
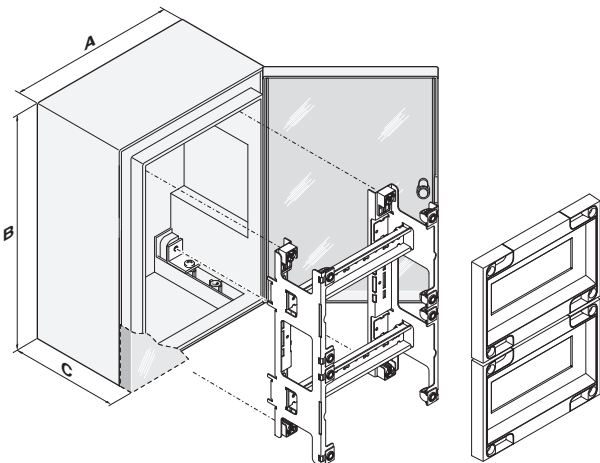
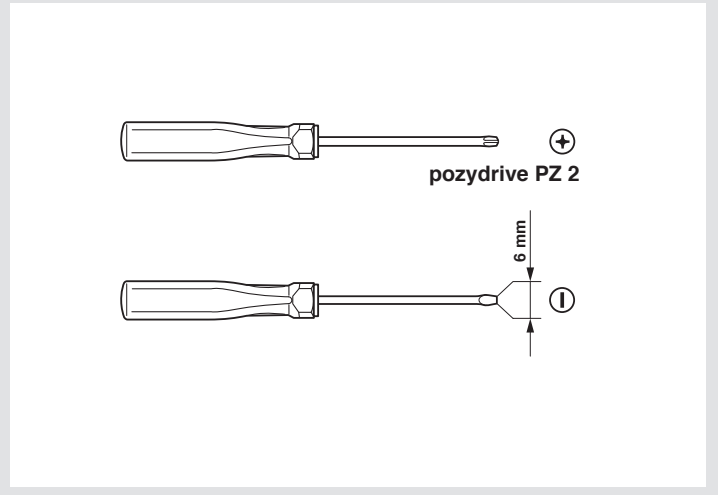
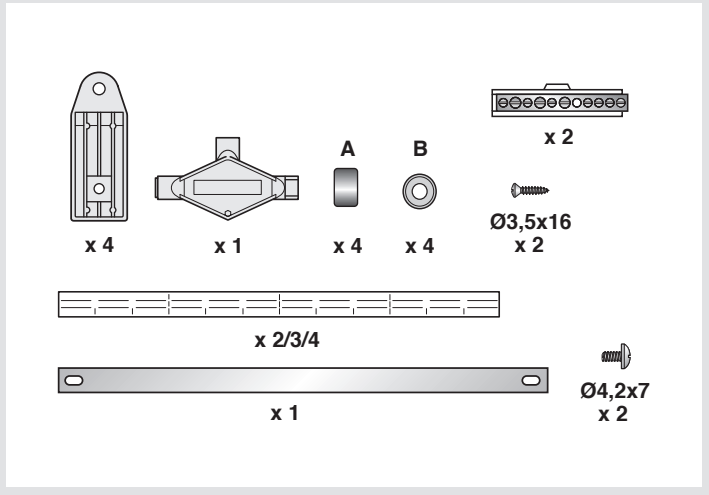
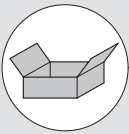





vector

- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GR) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu


- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Mont žas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar
- (AR) دليل التثبيت

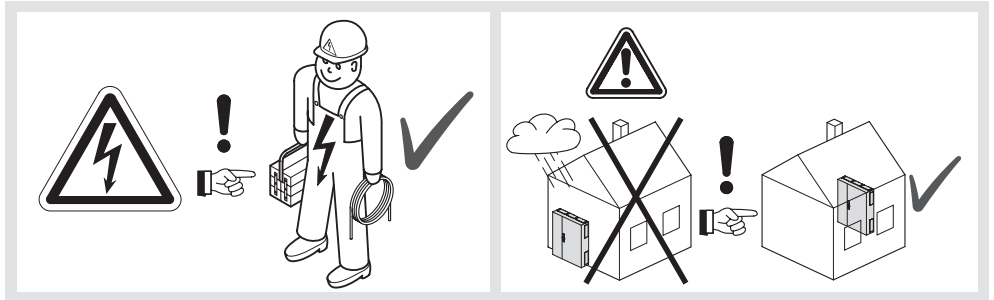


	A	B	C
VP20M	250	350	160
VP36M	300	500	160
VP54M	400	500	210
VP72M	400	650	210

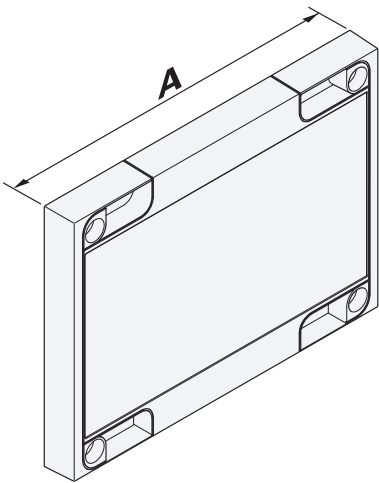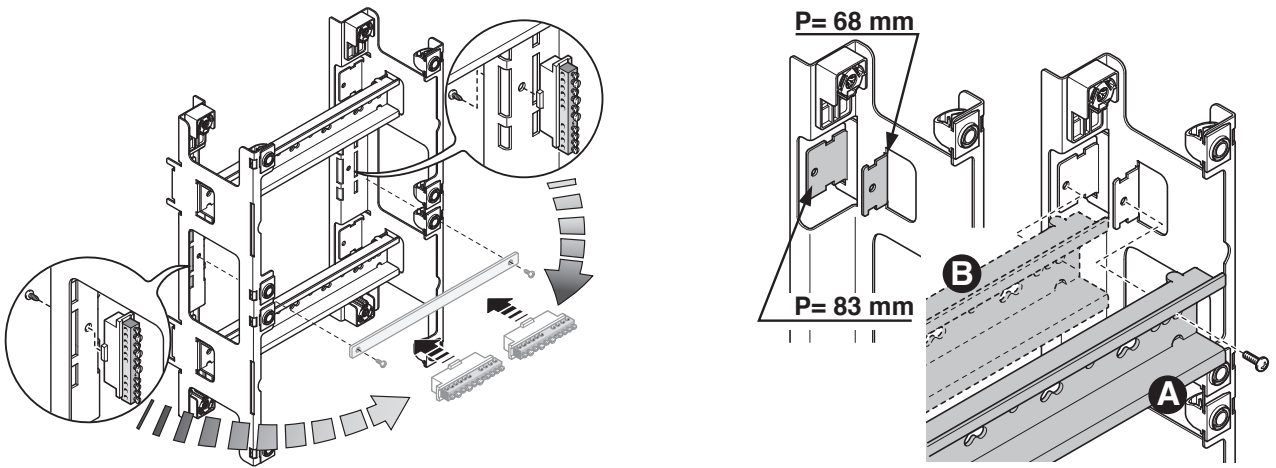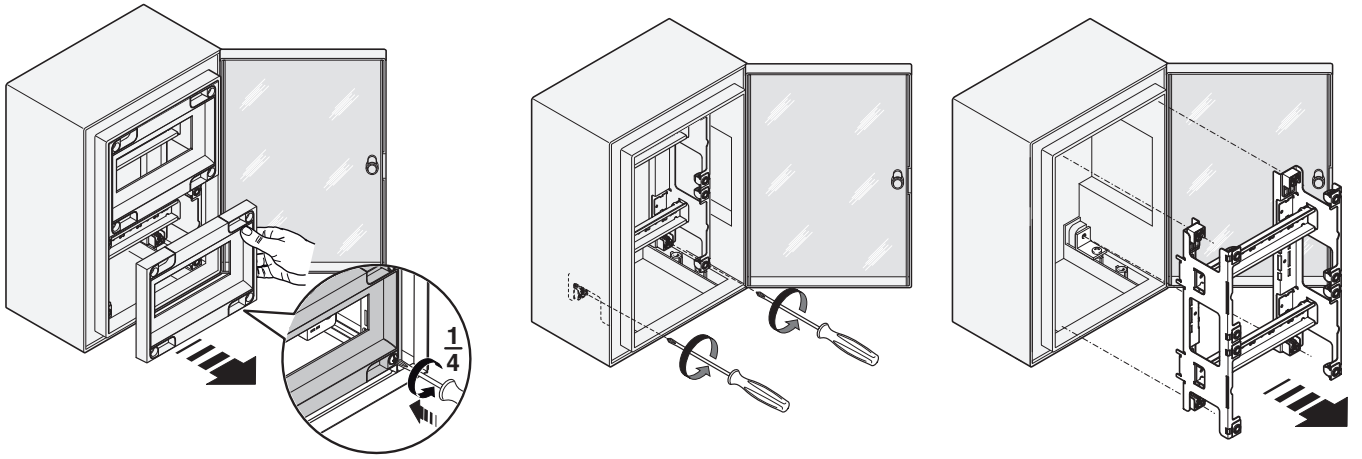






	A
FL711E	250
FL712E	350

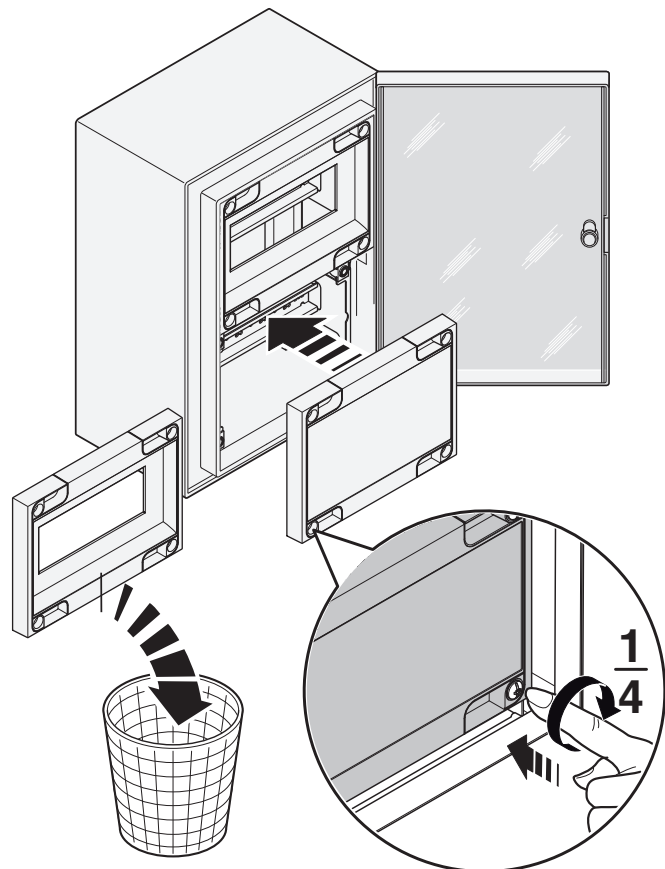


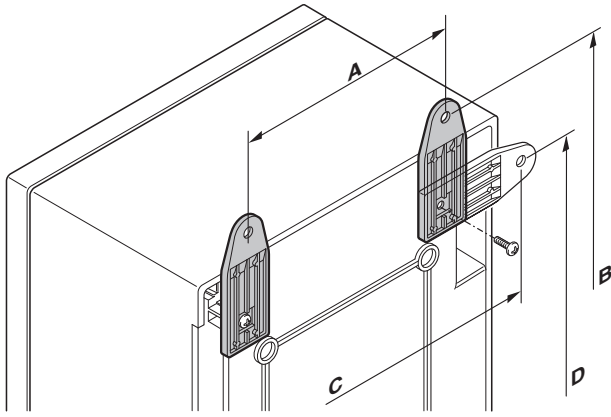




	A	B	C	D
VP20M	170	386	286	270
VP36M	220	536	336	420
VP54M	320	536	436	420
VP72M	320	686	436	570

	A	B
VP20M	150	210
VP36M	200	350
VP54M	300	350
VP72M	300	500

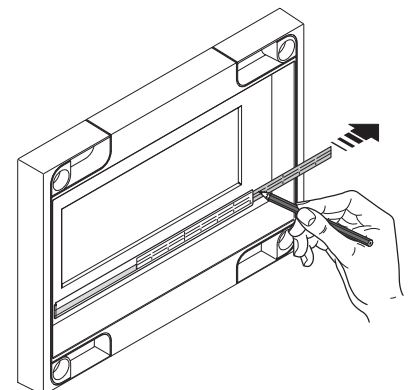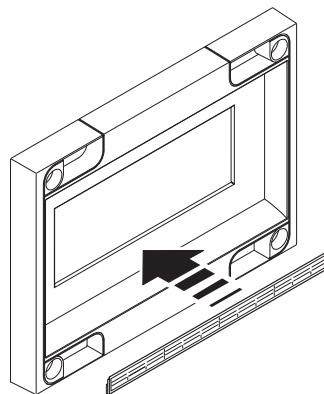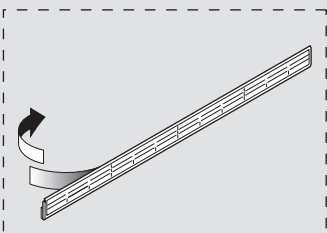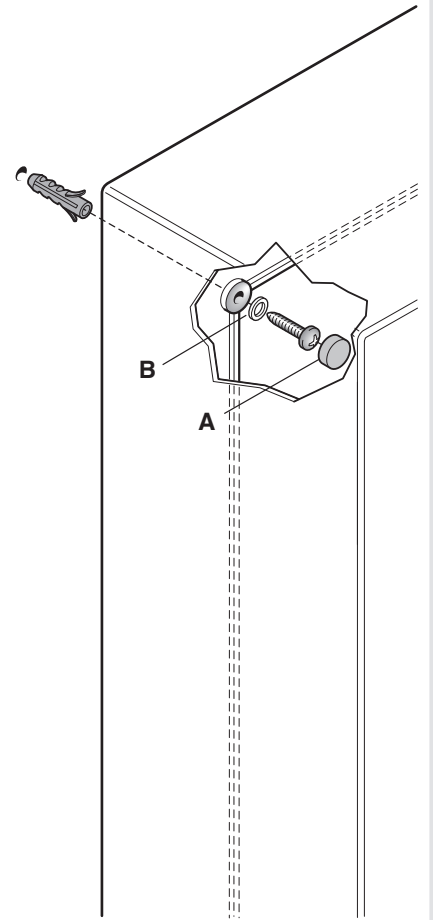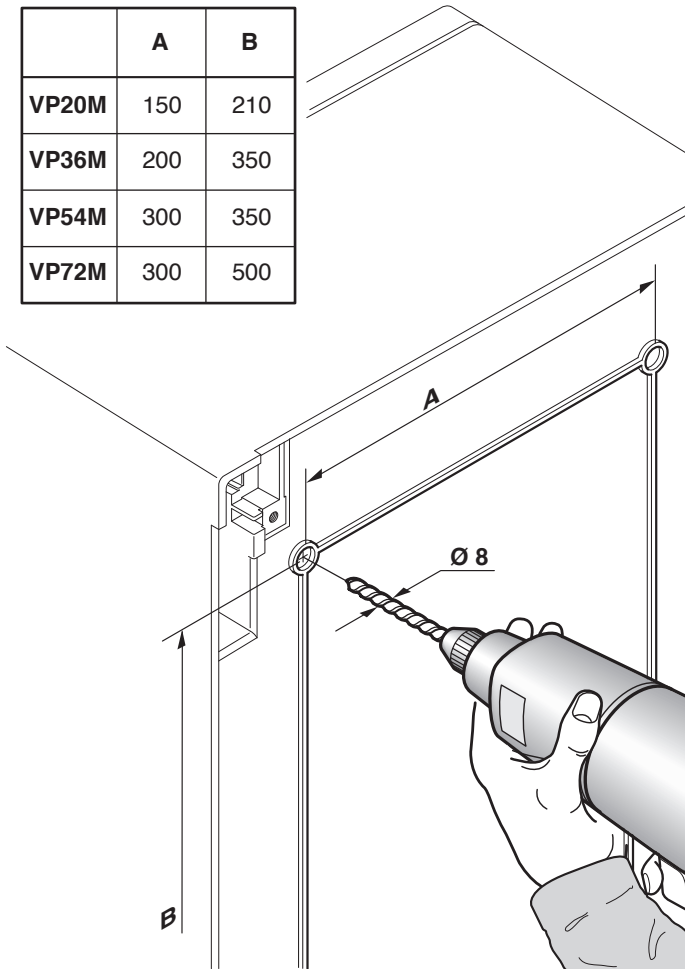

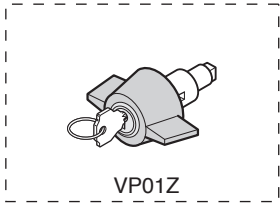

VP01Z

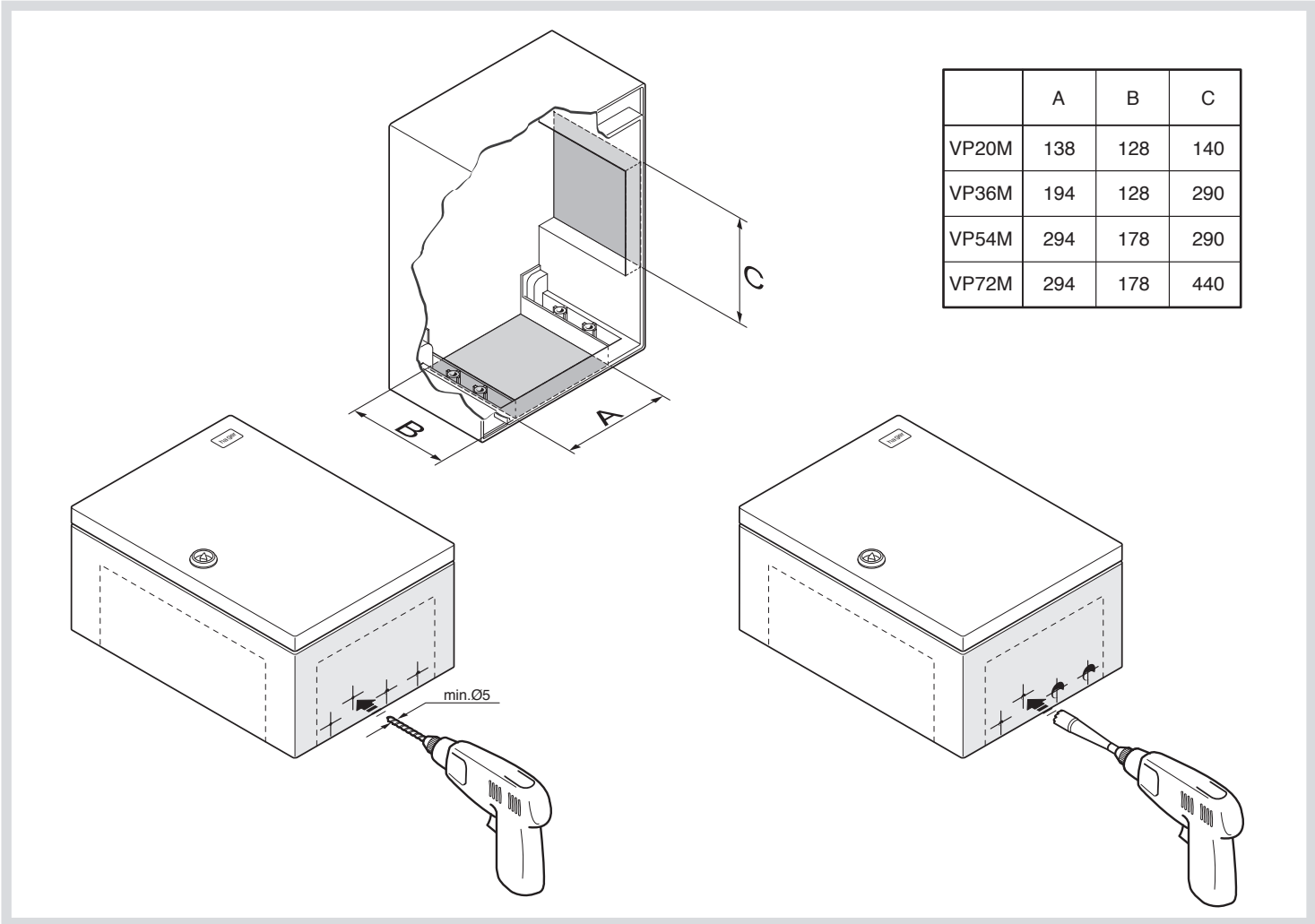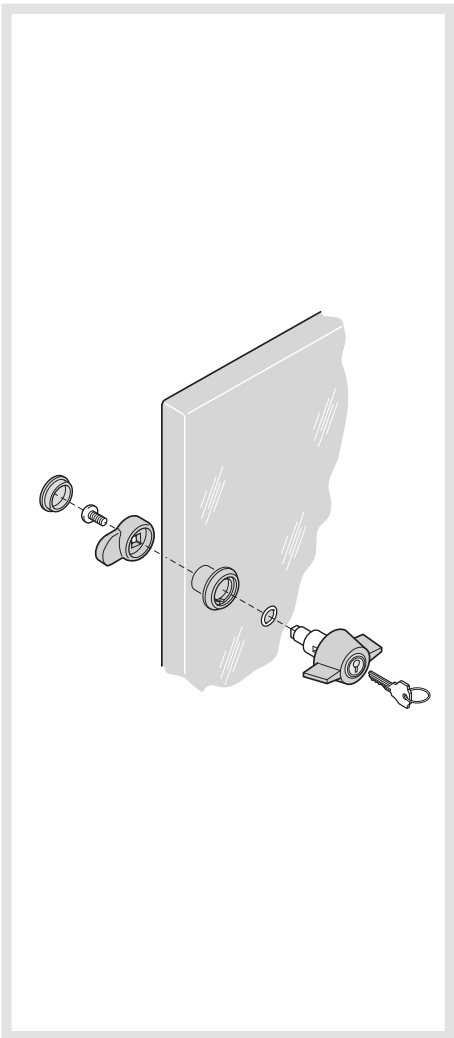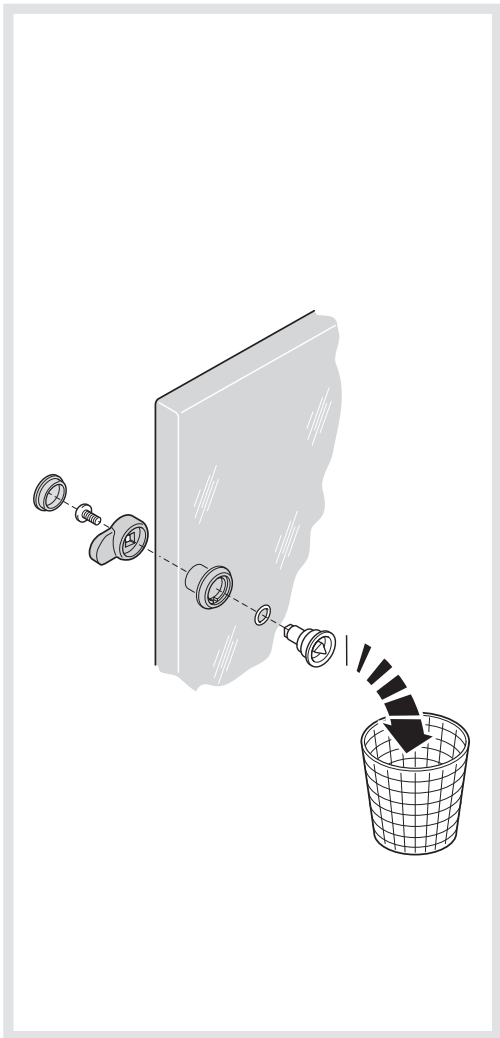

	A	B	C
VP20M	138	128	140
VP36M	194	128	290
VP54M	294	178	290
VP72M	294	178	440