






6FZ02600c

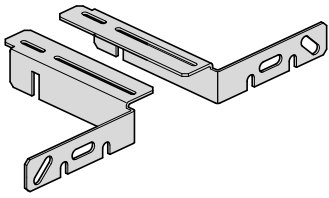


univers











- ⒹⒺ Montageanleitung
- ⒻⒻ Notice d'instructions
- ⒼⒸ Mounting instructions
- ⒶⒶ Montage instructie
- ⒹⒶ Monteringsvejledning
- ⒻⒶ Asennusohje
- ⒶⒶ Montasjeanvisning
- ⒶⒶ Monterings instruktioner
- ⒶⒶ Istruzioni di montaggio
- ⒶⒶ Instrucciones de montaje
- ⒶⒶ Instruções de montagem
- ⒶⒶ Montážní návod
- ⒶⒶ Uputstvo za montažu













- ⒻⒶ Upute za montažu
- ⒻⒶ Szerelési útmutató
- ⒻⒶ Montavimo instrukcija
- ⒻⒶ Montāžas instrukcija
- ⒻⒶ Instrukcja montażowa
- ⒻⒶ Instrucțiuni de montare
- ⒻⒶ Návod na montáž
- ⒻⒶ Инструкция по монтажу
- ⒻⒶ Инструкции за монтаж
- ⒻⒶ Οδηγίες χώνευσης
- ⒻⒶ Navodilo za montažo
- ⒻⒶ Paigaldusjuhised
- ⒻⒶ Leiðbeiningar







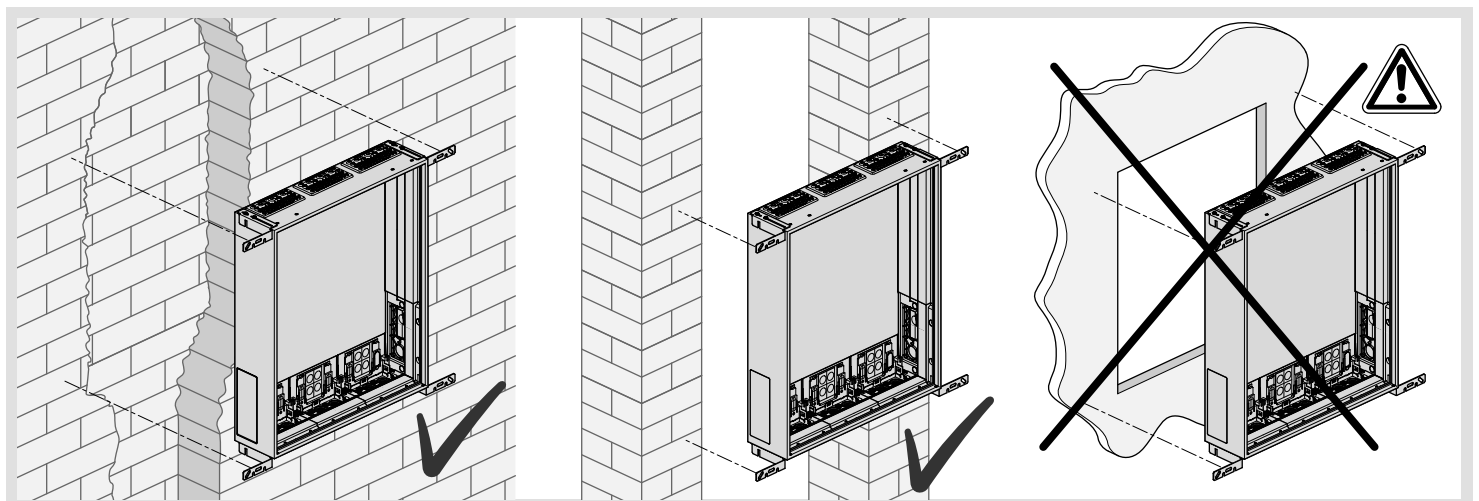
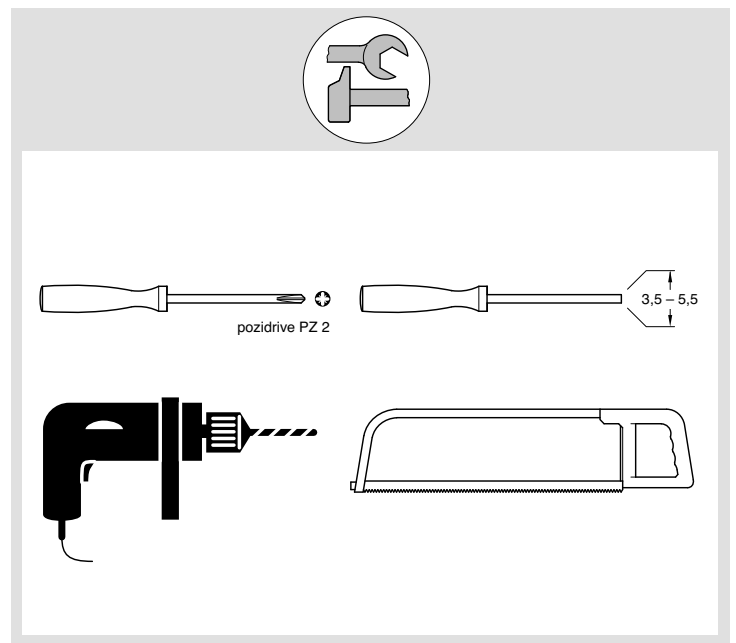
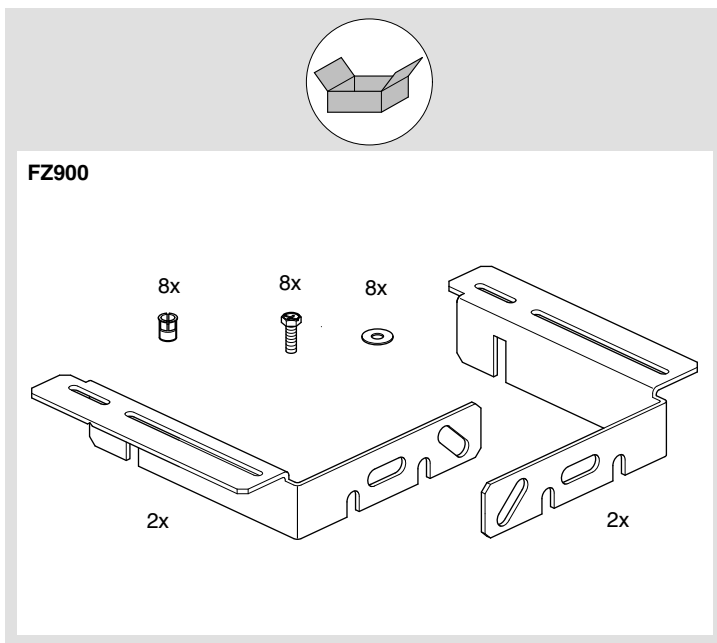
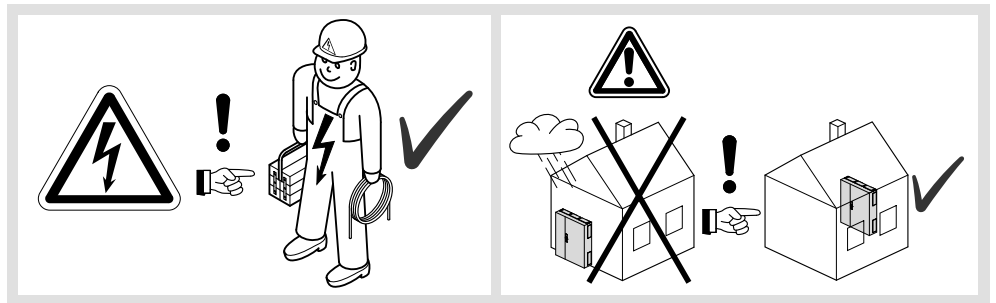


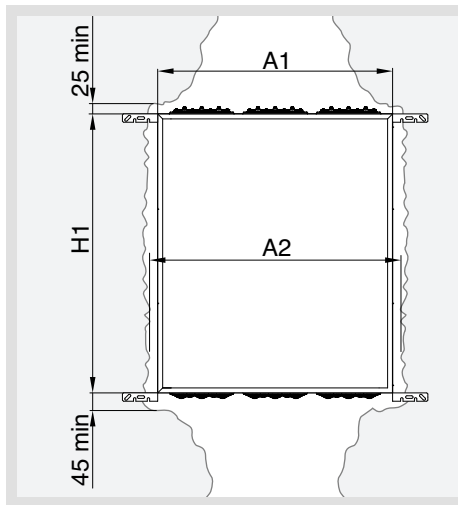


H1	A1	A2	T
800	300	320	205
950	550	570	160 / 205
1100	800	820	160 / 205
1250	1050	1070	205
1400	1300	1320	205

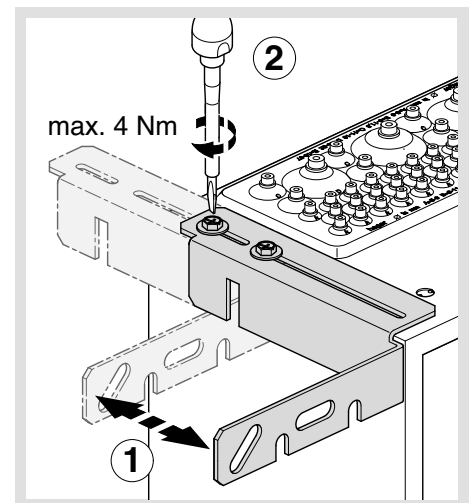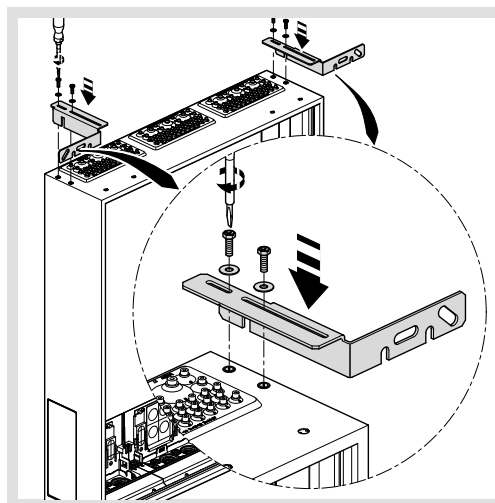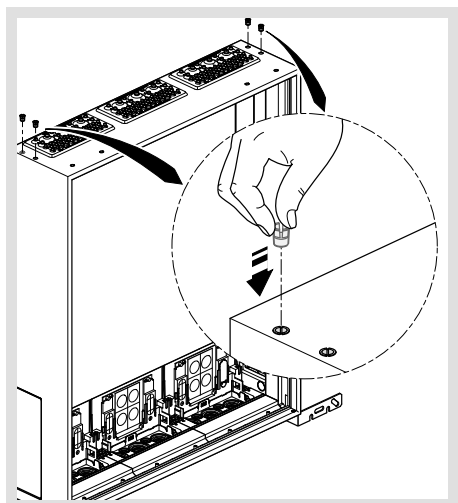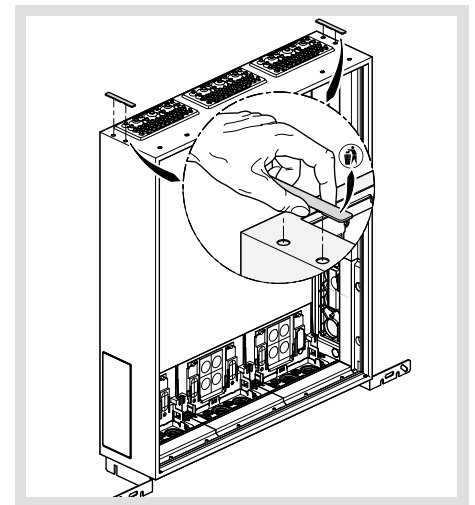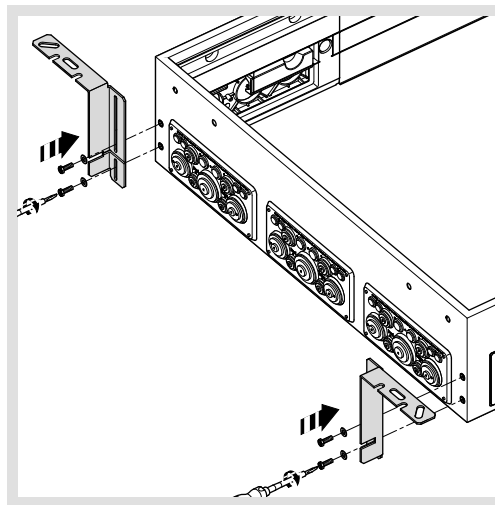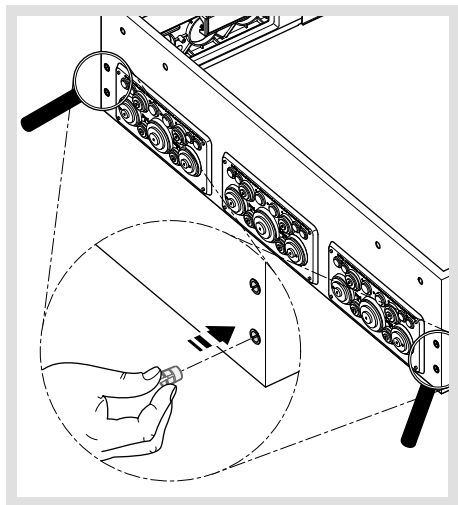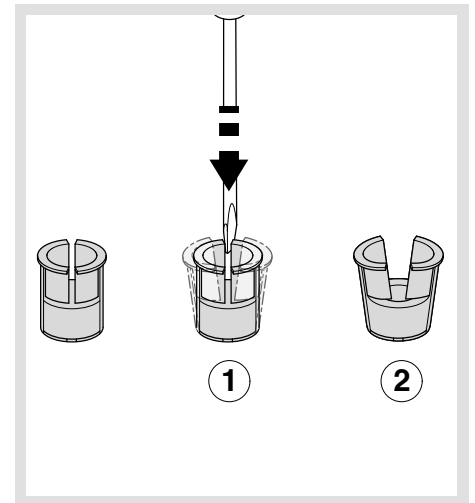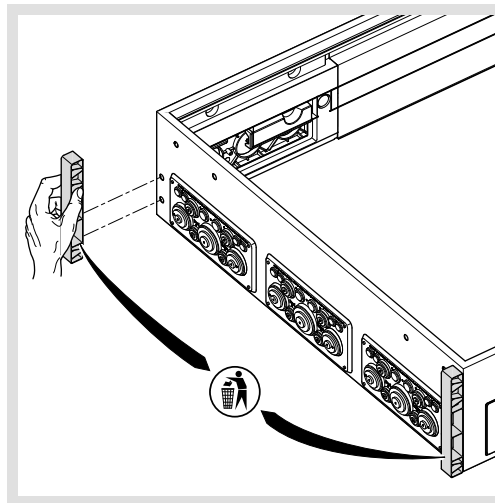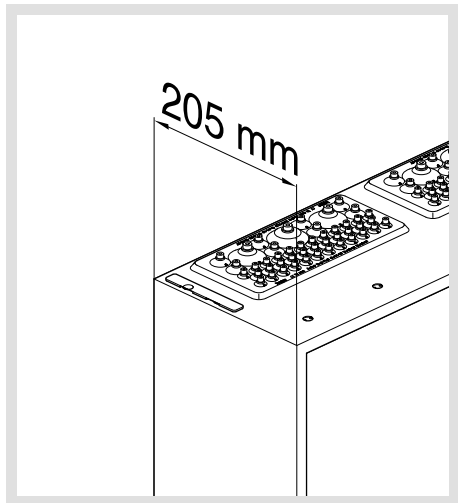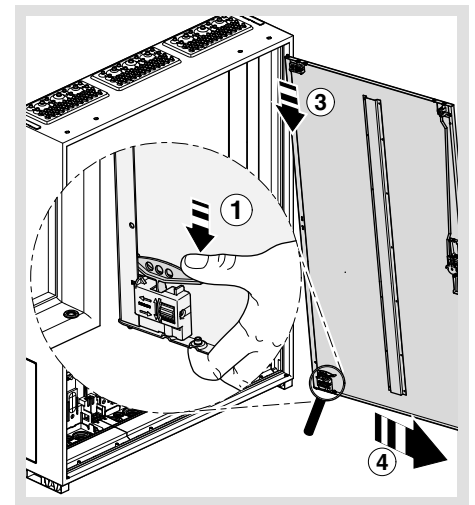

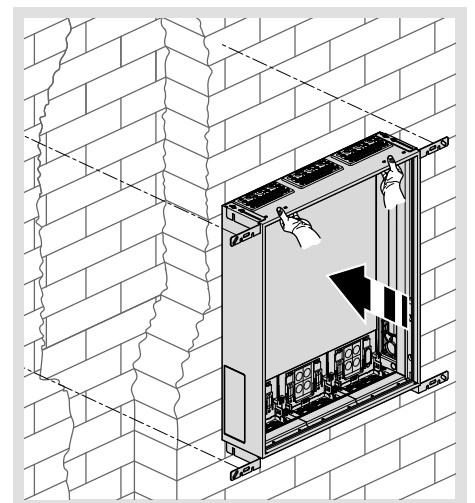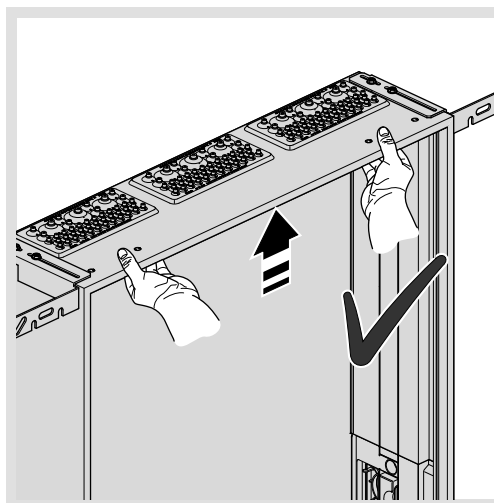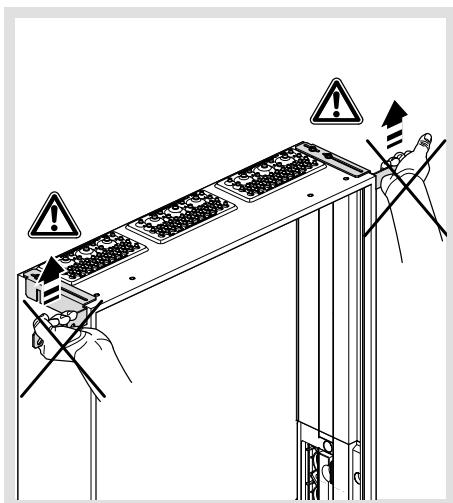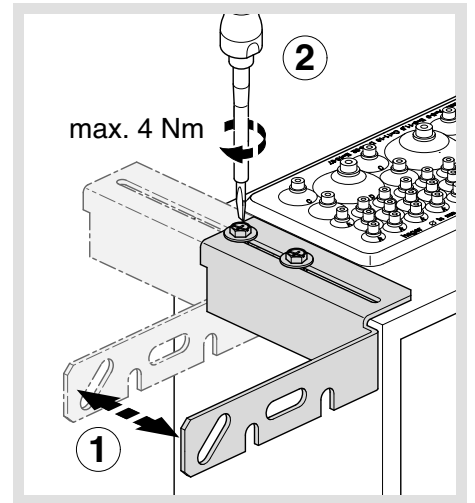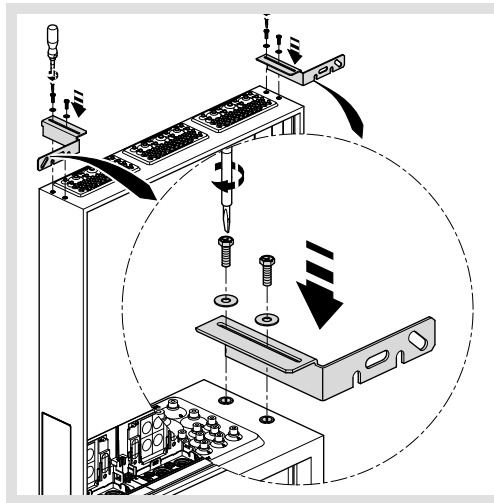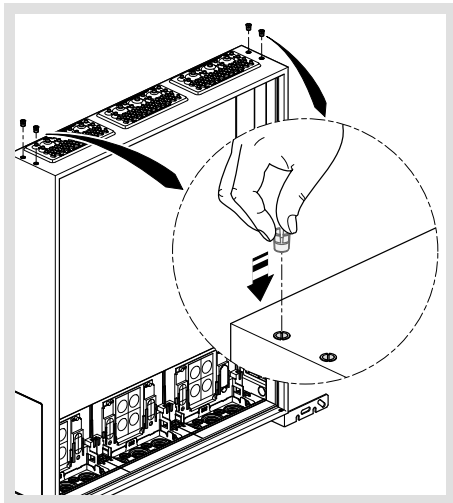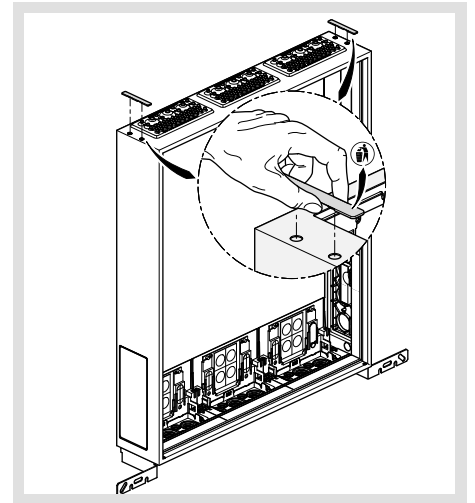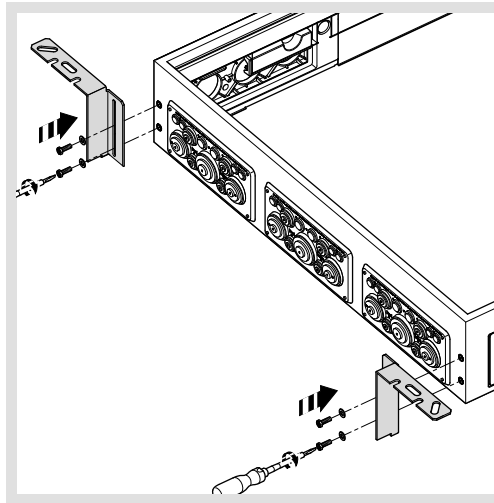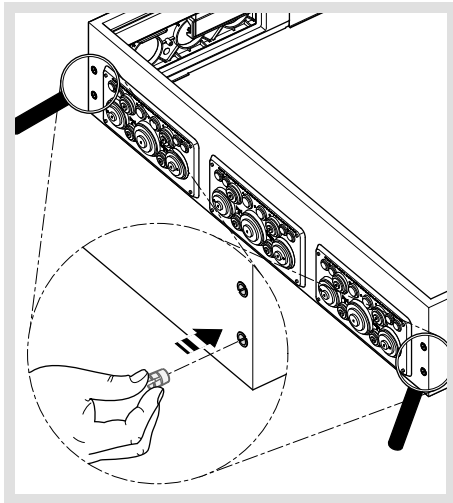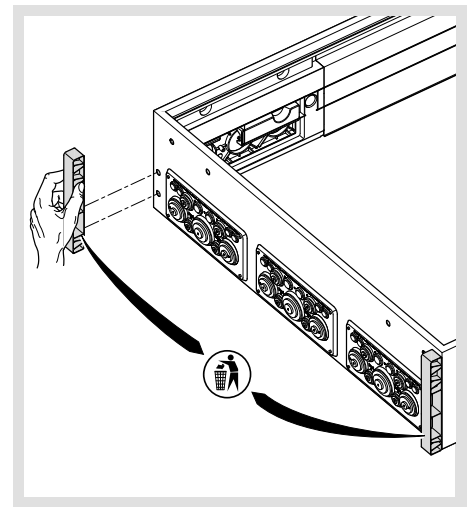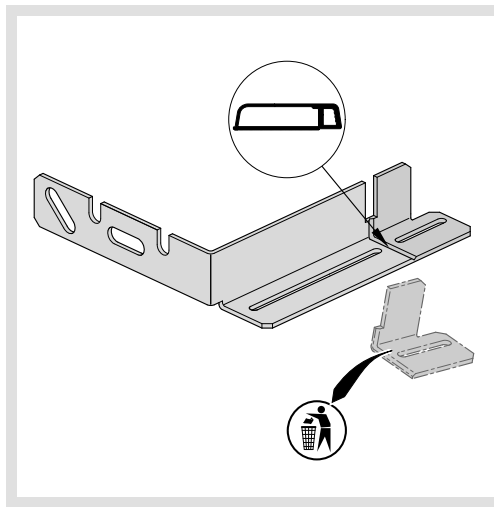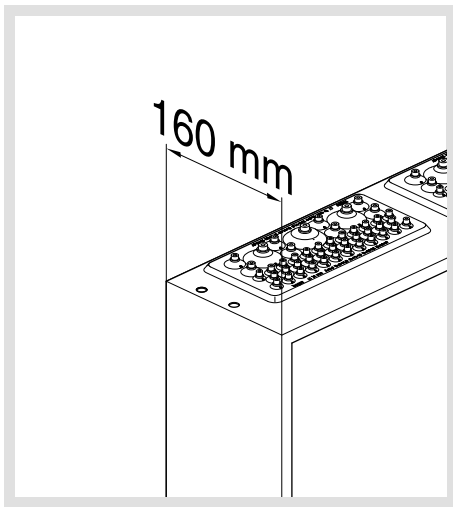

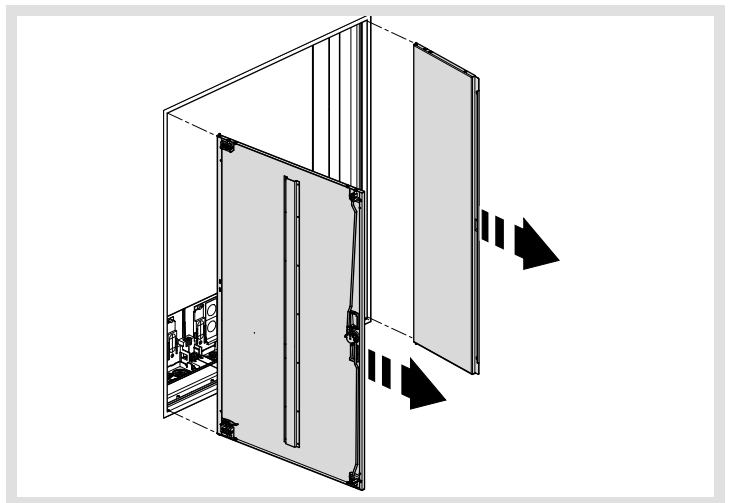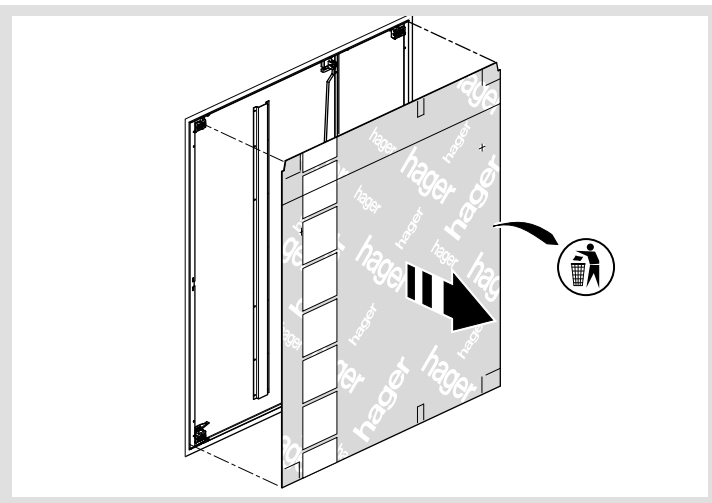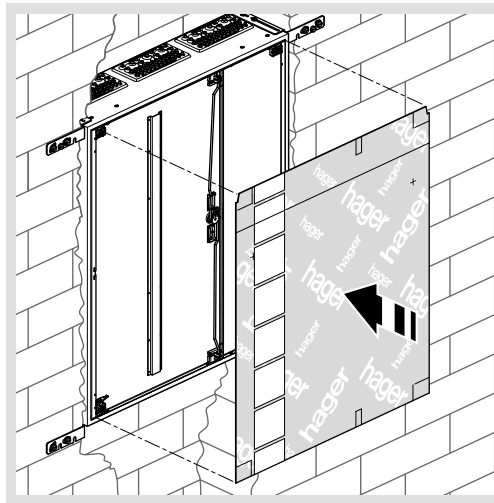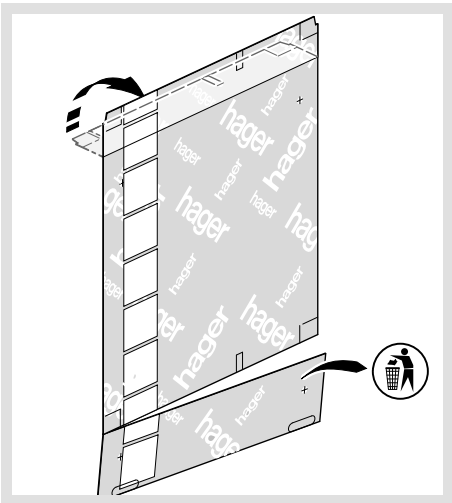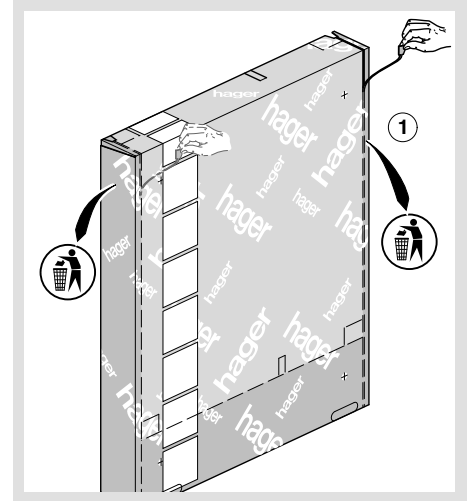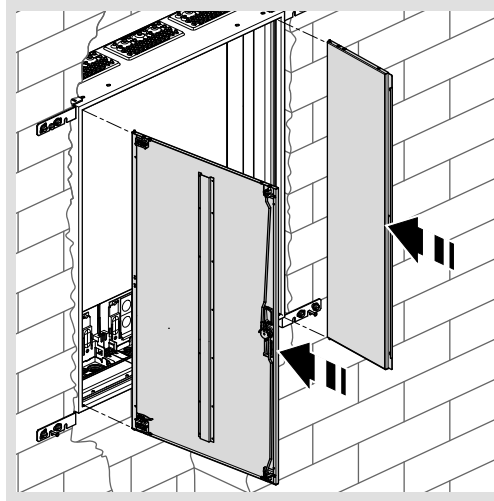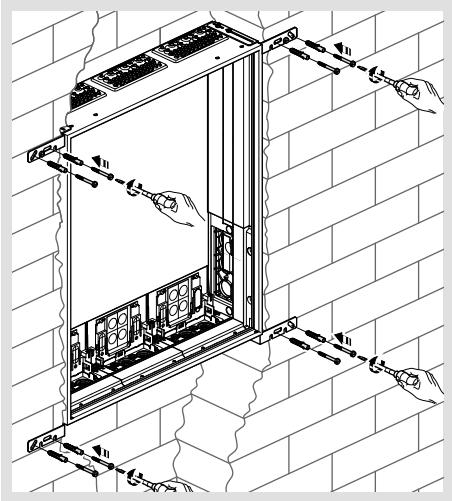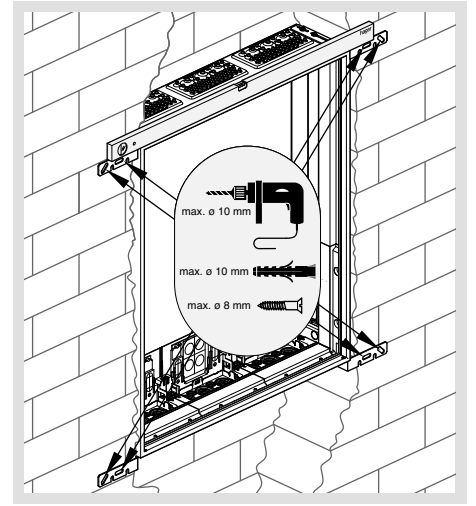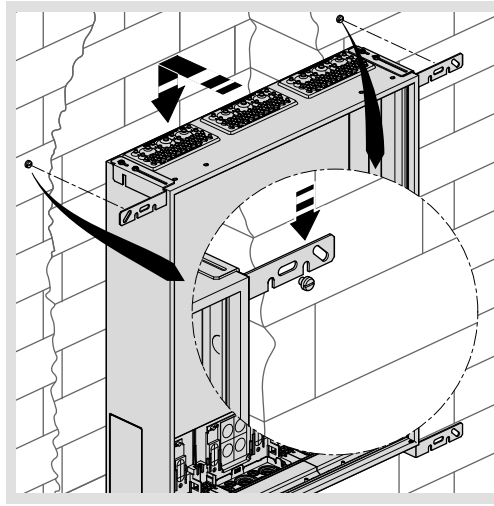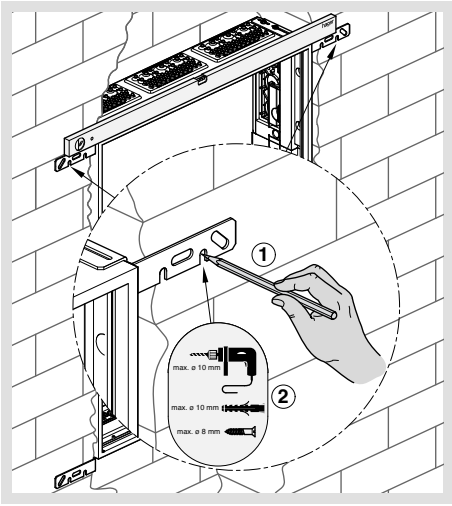

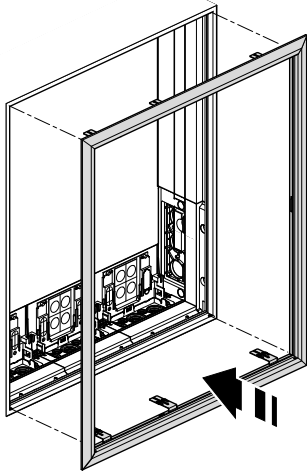

Breite Höhe	300	550	800	1050	1300
500	FZ011B	FZ012B	FZ013B	FZ014B	FZ015B
650	FZ021B	FZ022B	FZ023B	FZ024B	FZ025B
800	FZ11B	FZ12B	FZ13B	FZ14B	FZ15B
950	FZ21B	FZ22B	FZ23B	FZ24B	FZ25B
1100	FZ31B	FZ32B	FZ33B	FZ34B	FZ35B
1250	FZ41B	FZ42B	FZ43B	FZ44B	FZ45B
1400	FZ51B	FZ52B	FZ53B	FZ54B	FZ55B

