

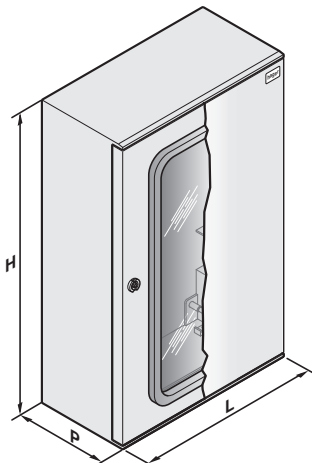
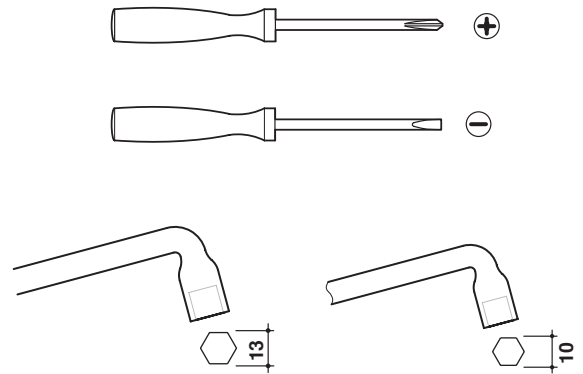
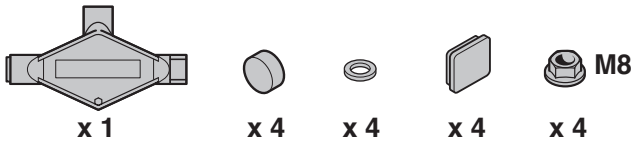
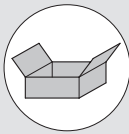


orion plus

- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu
- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Mont žas instrukcija
- (PL) Instrukcja monta owa
- (RO) Instructiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar

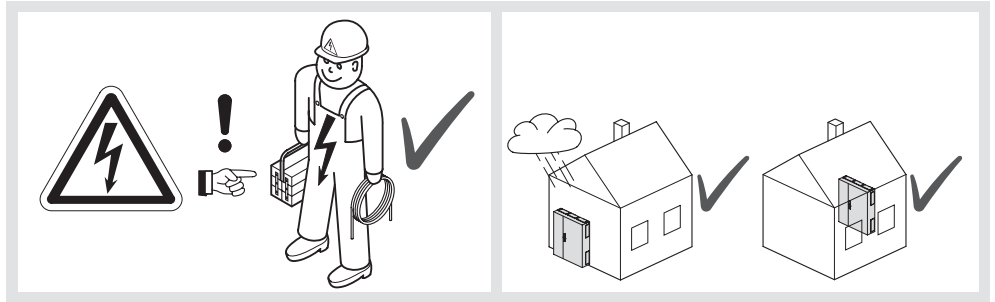


			H	L	P
S	FL204B	FL254B	350	300	160
	FL209B	FL259B	500	300	200
	FL213B	FL263B	500	400	200
	FL216B	FL266B	650	400	200
	FL221B	FL271B	650	500	250
	FL229B	FL279B	800	600	300
					C

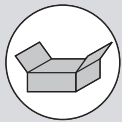


FL980A


S

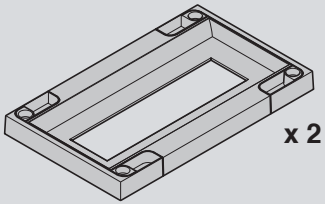

x 2



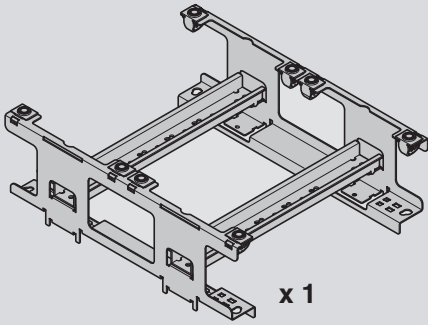


x 1

 

x 2







M8
x 4




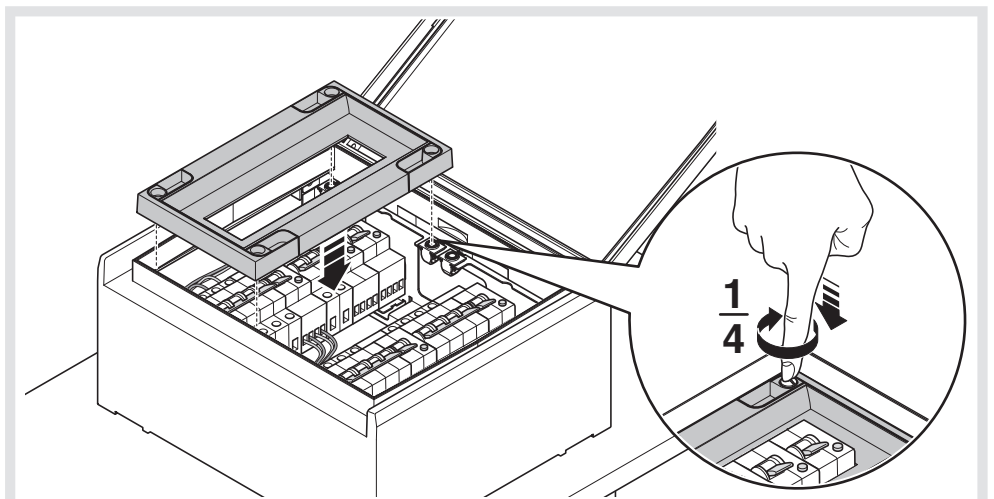
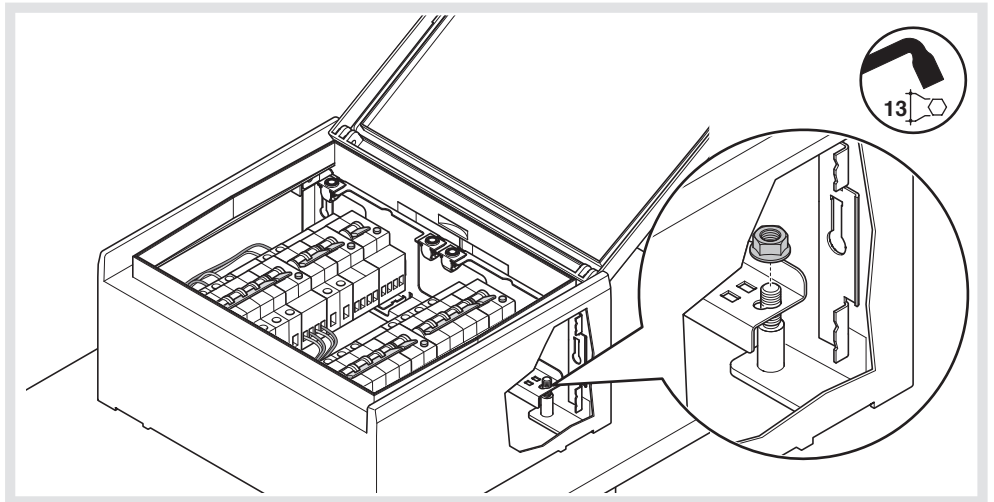
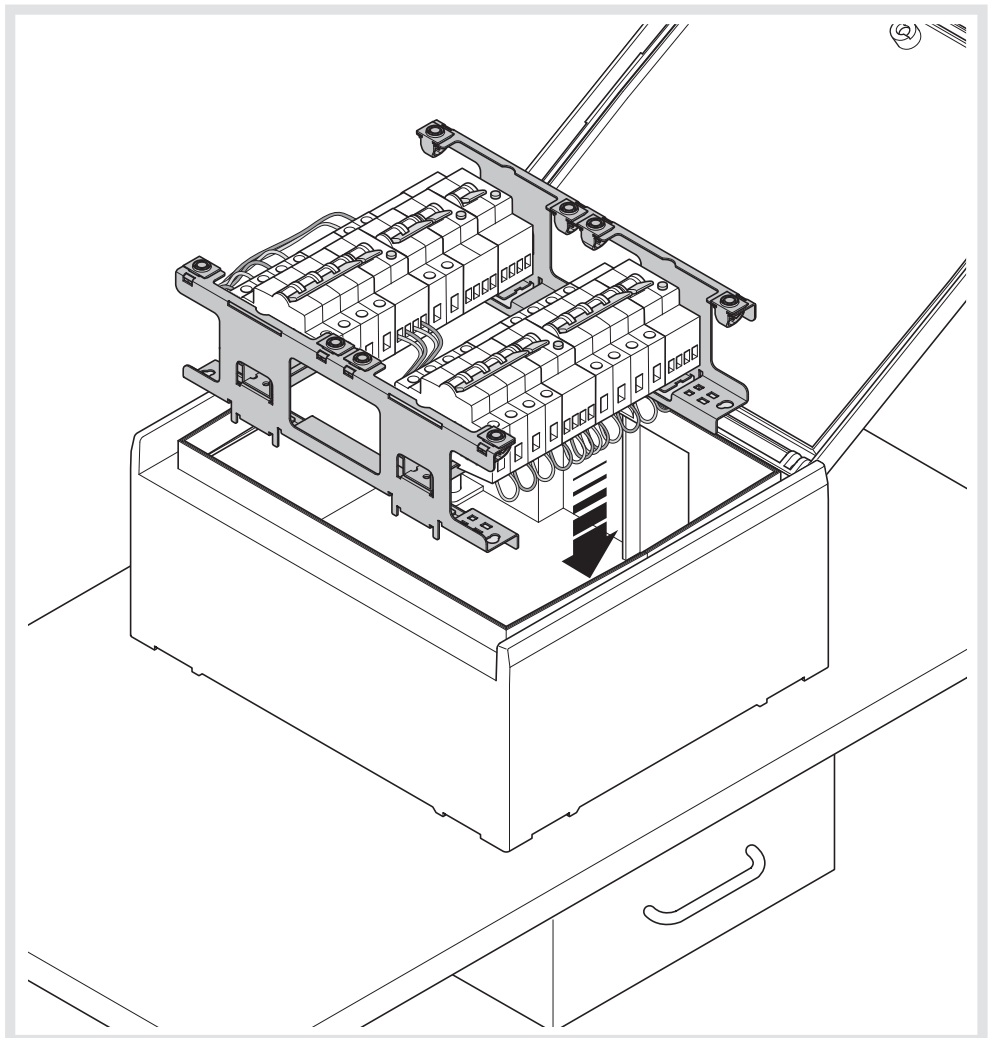











S

  FL981A ÷ FL983A

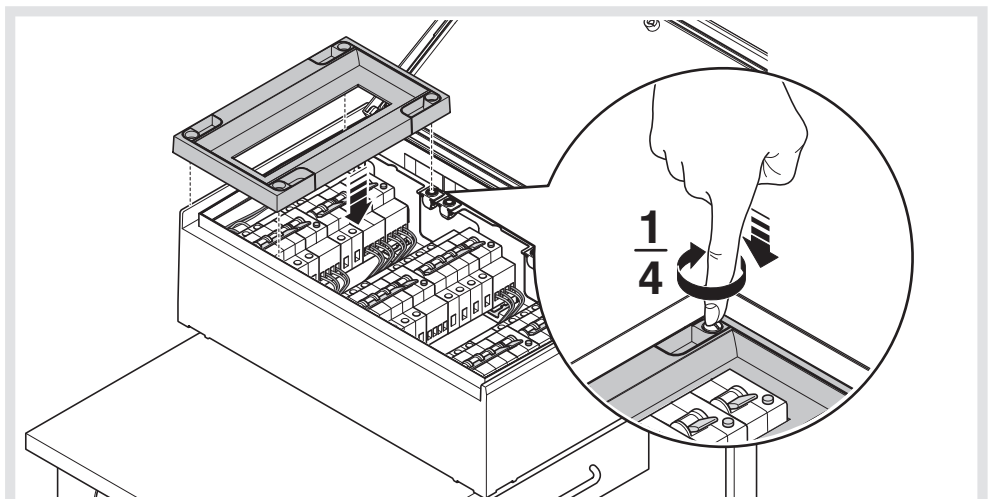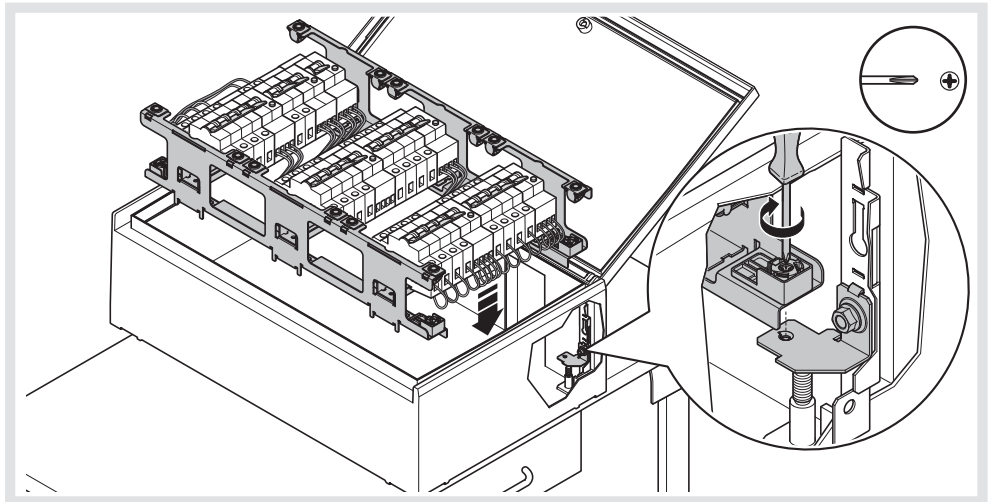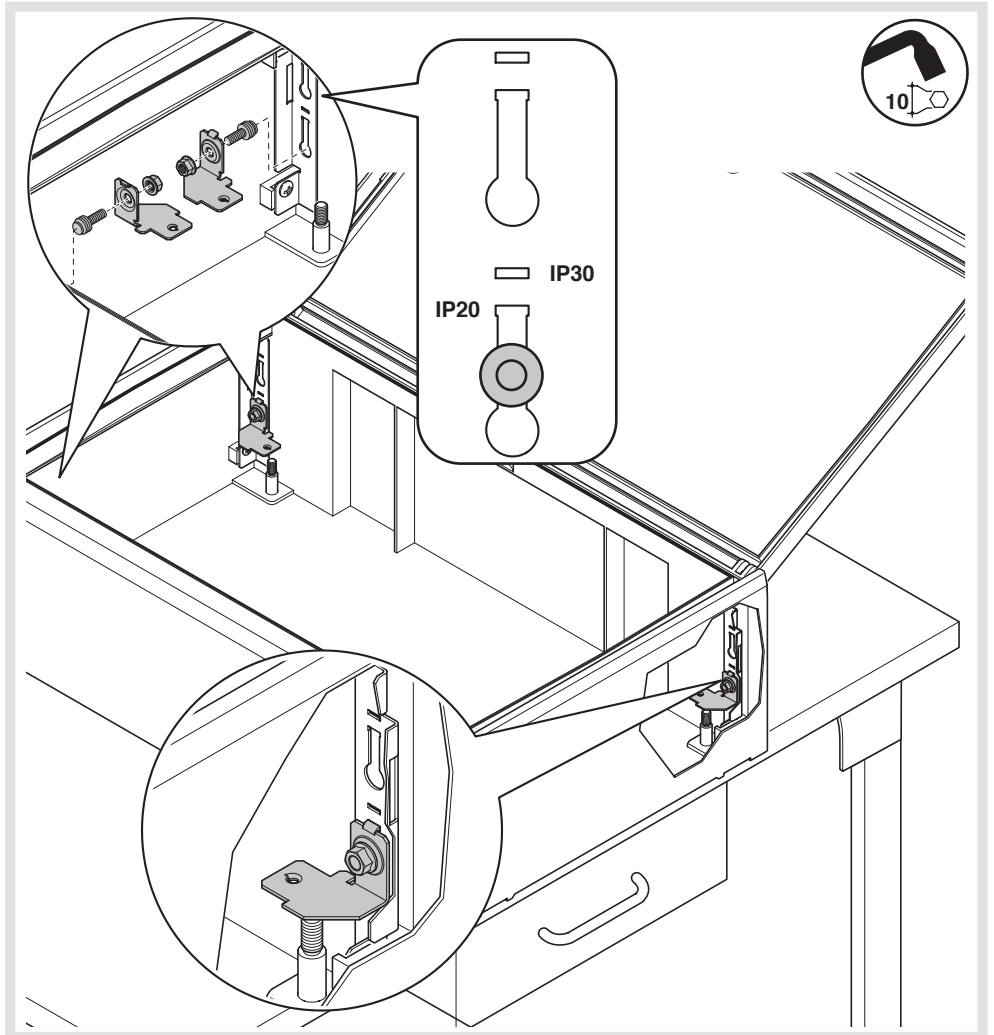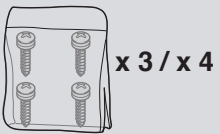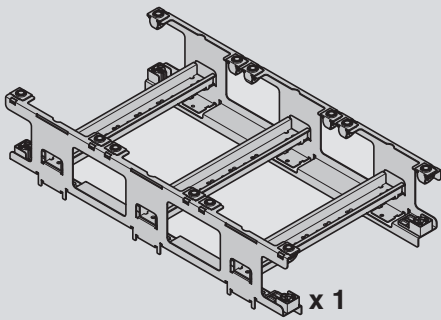
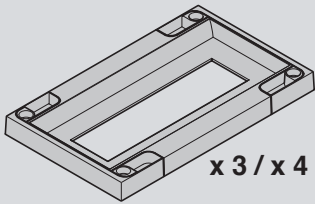


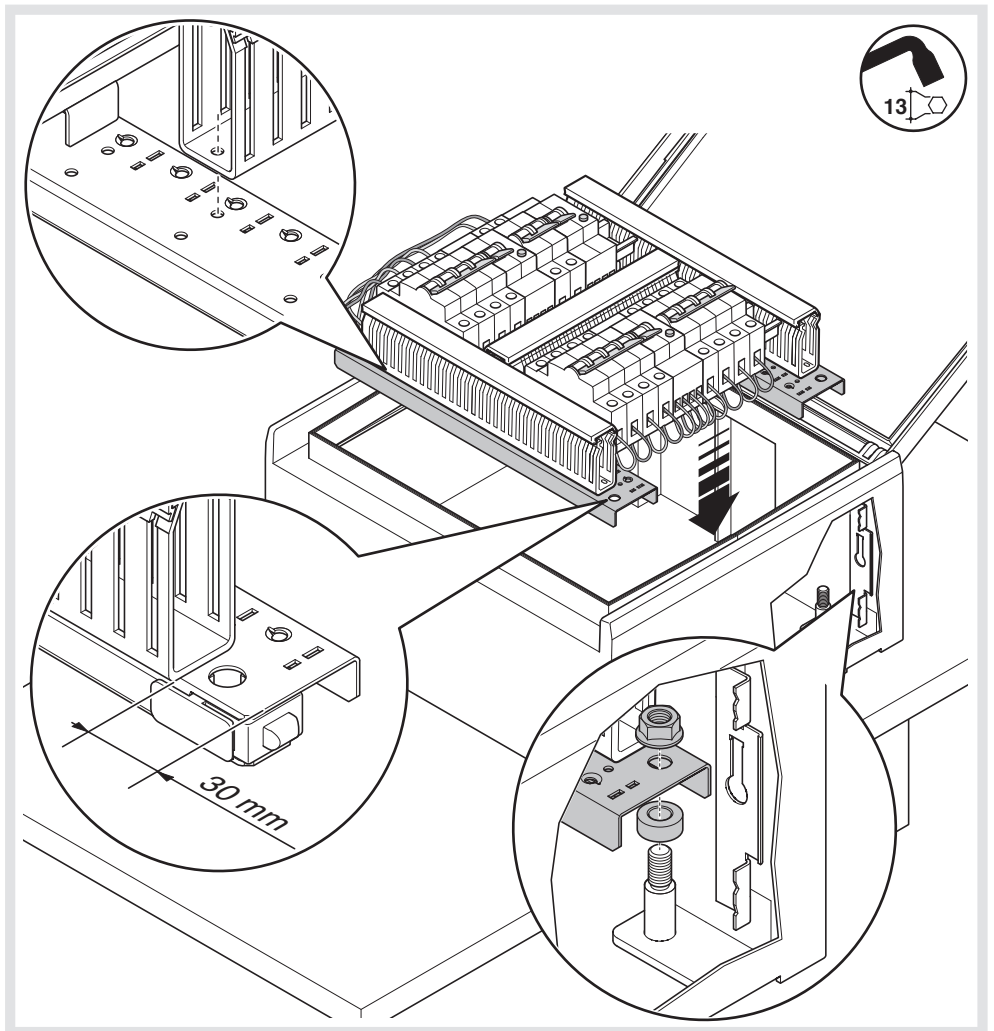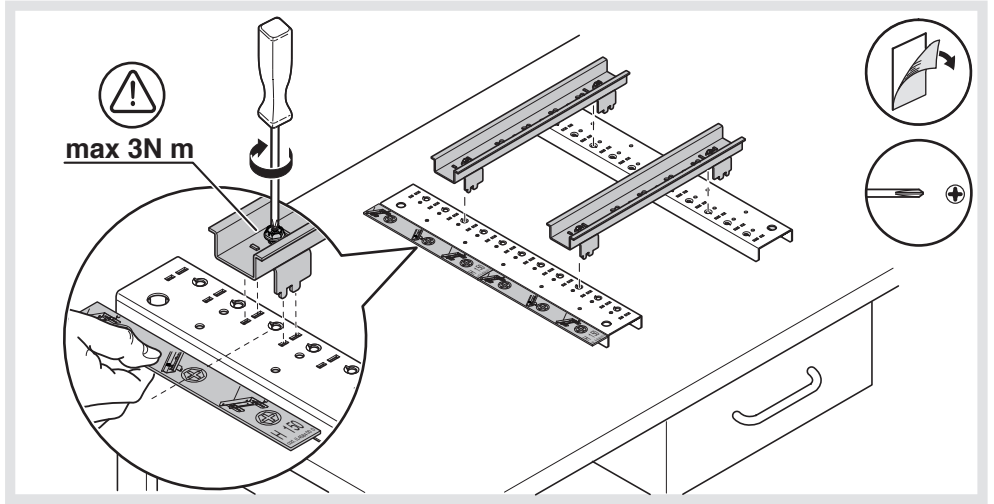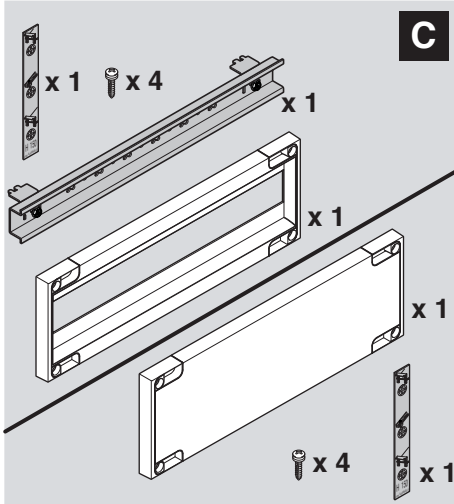
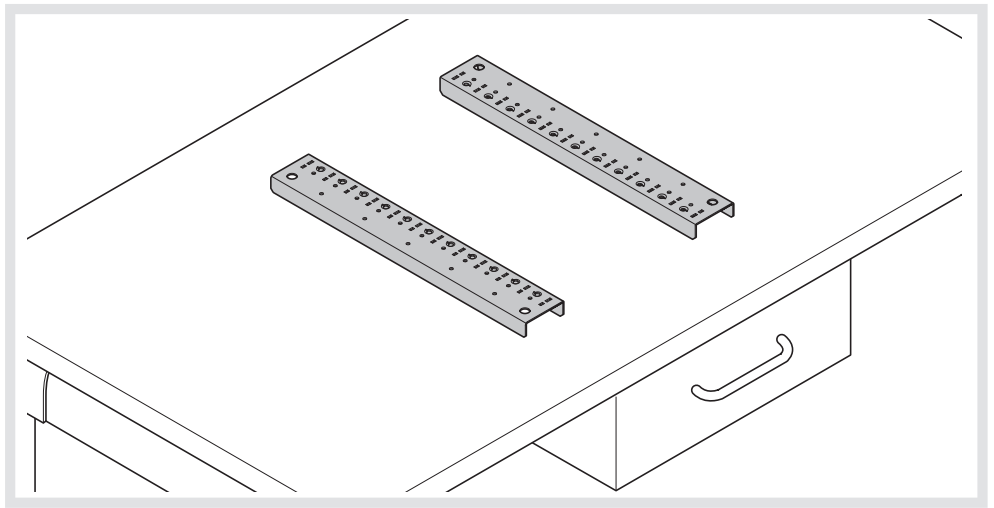
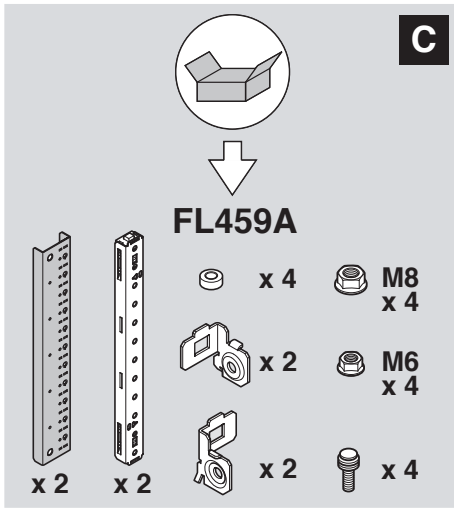


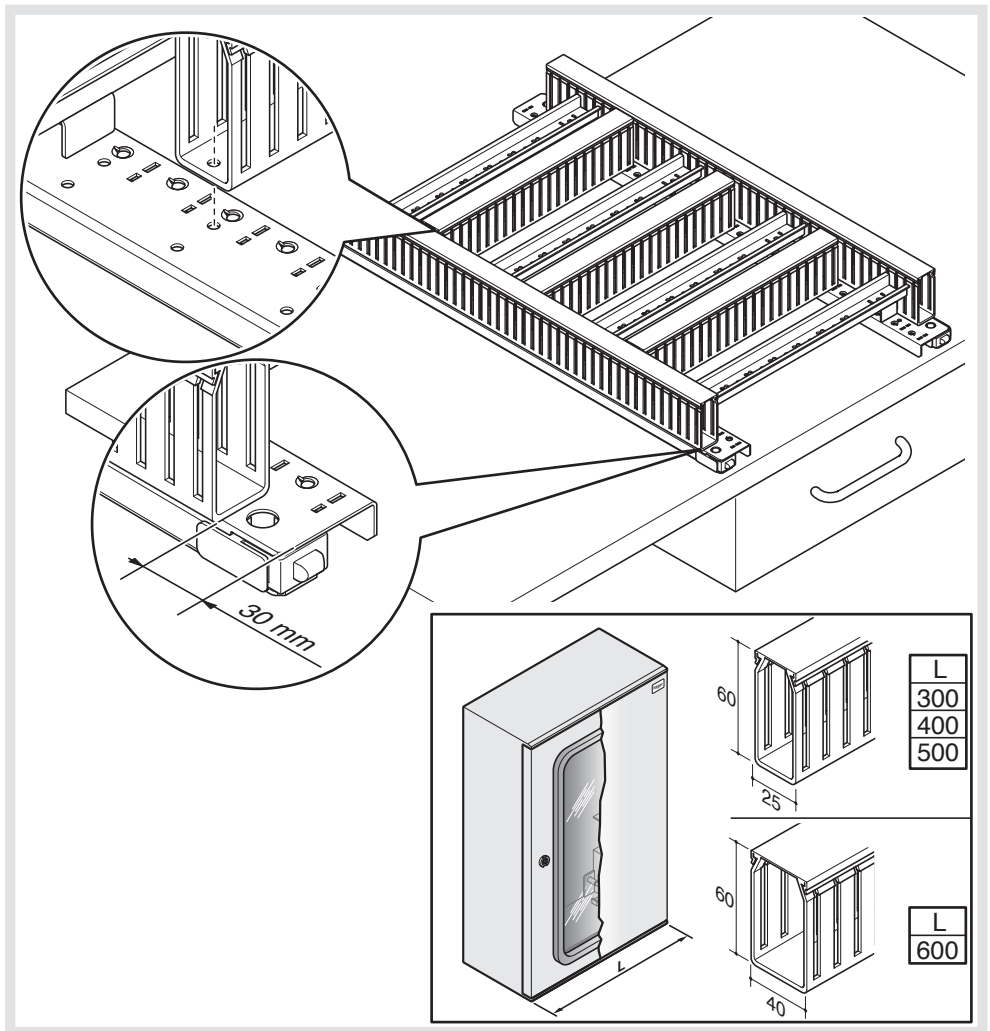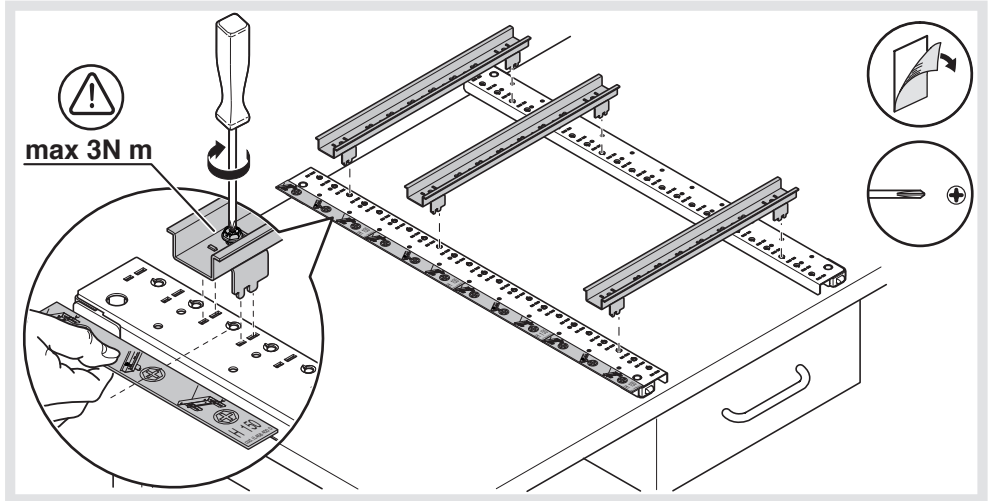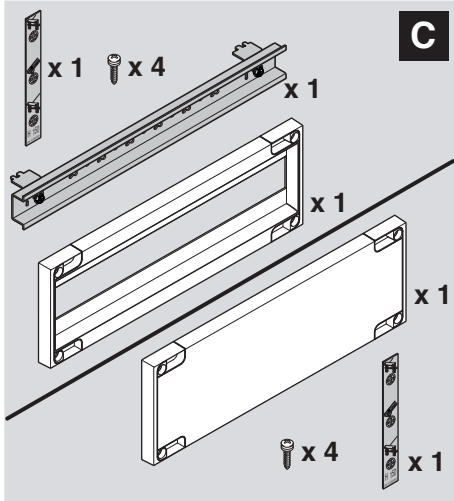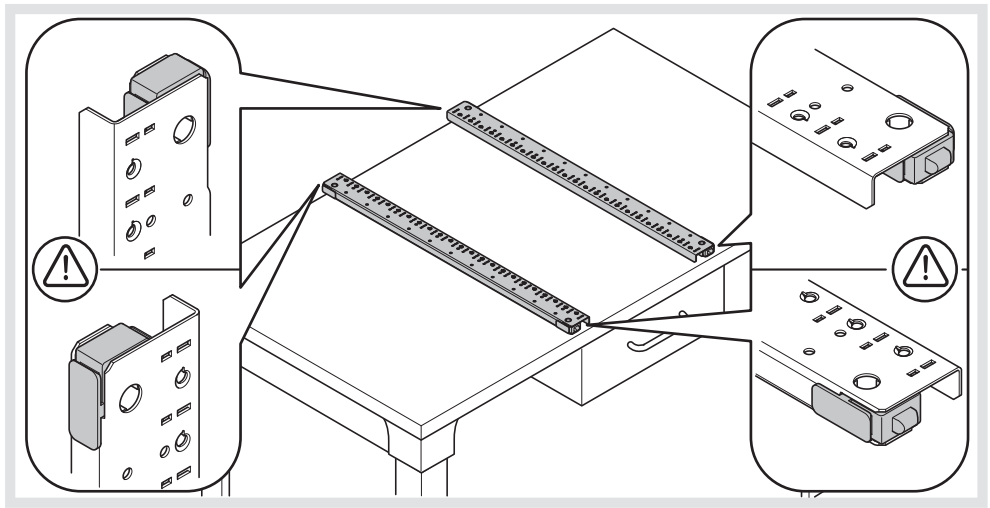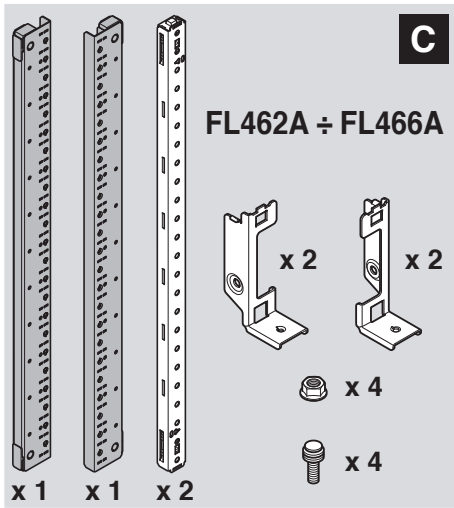





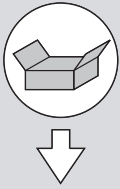








C

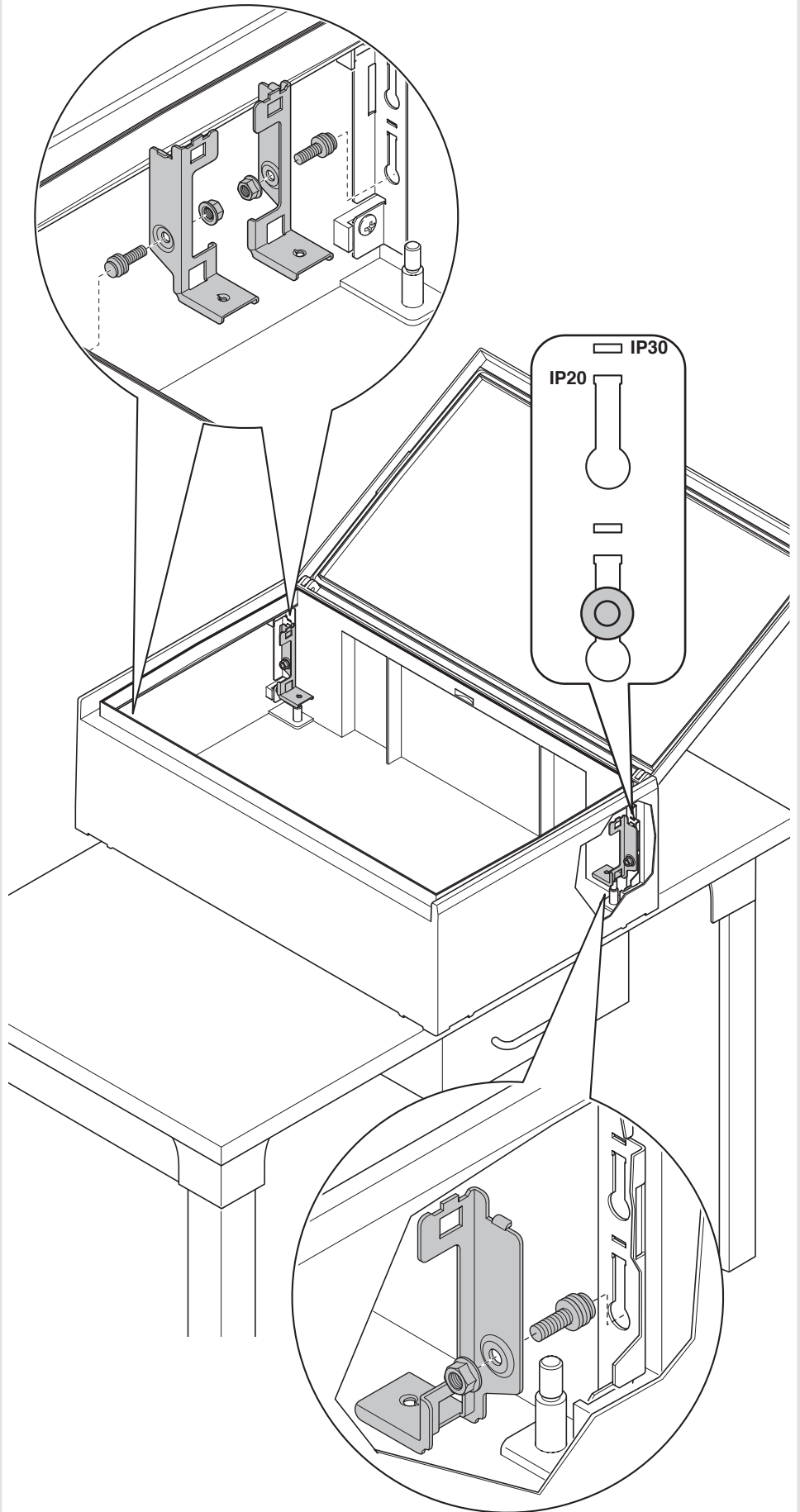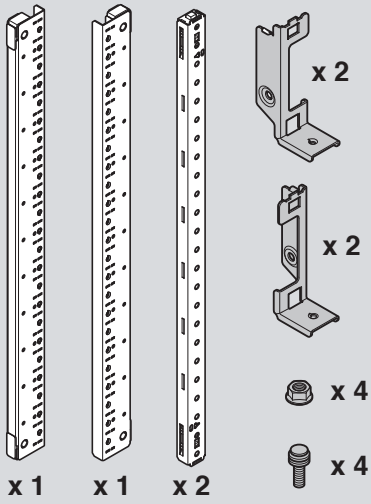

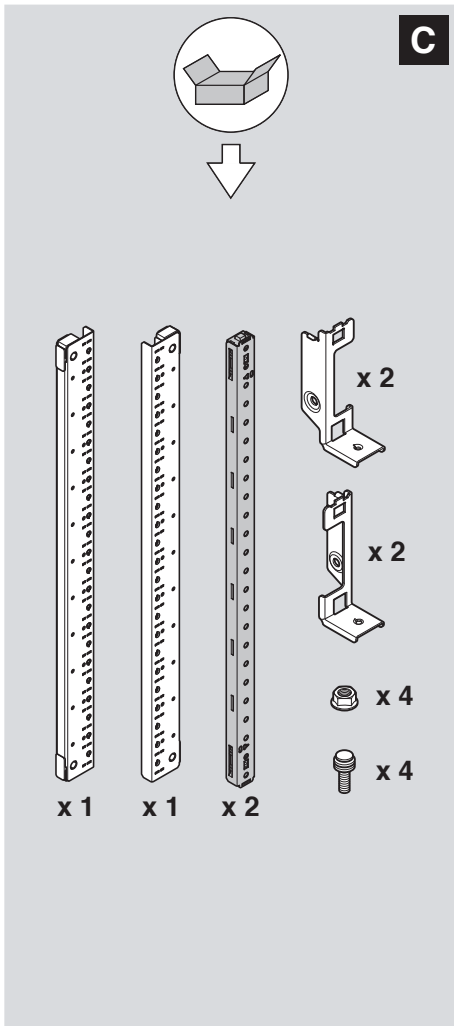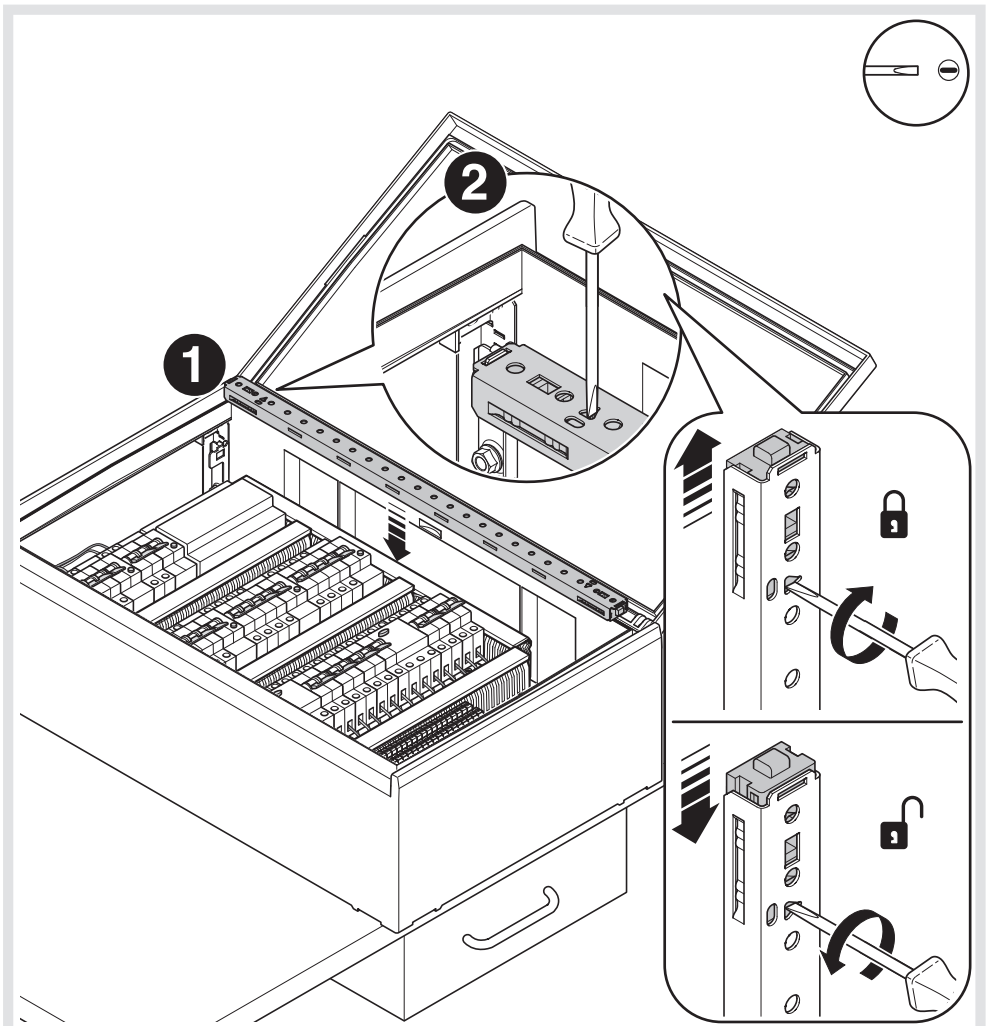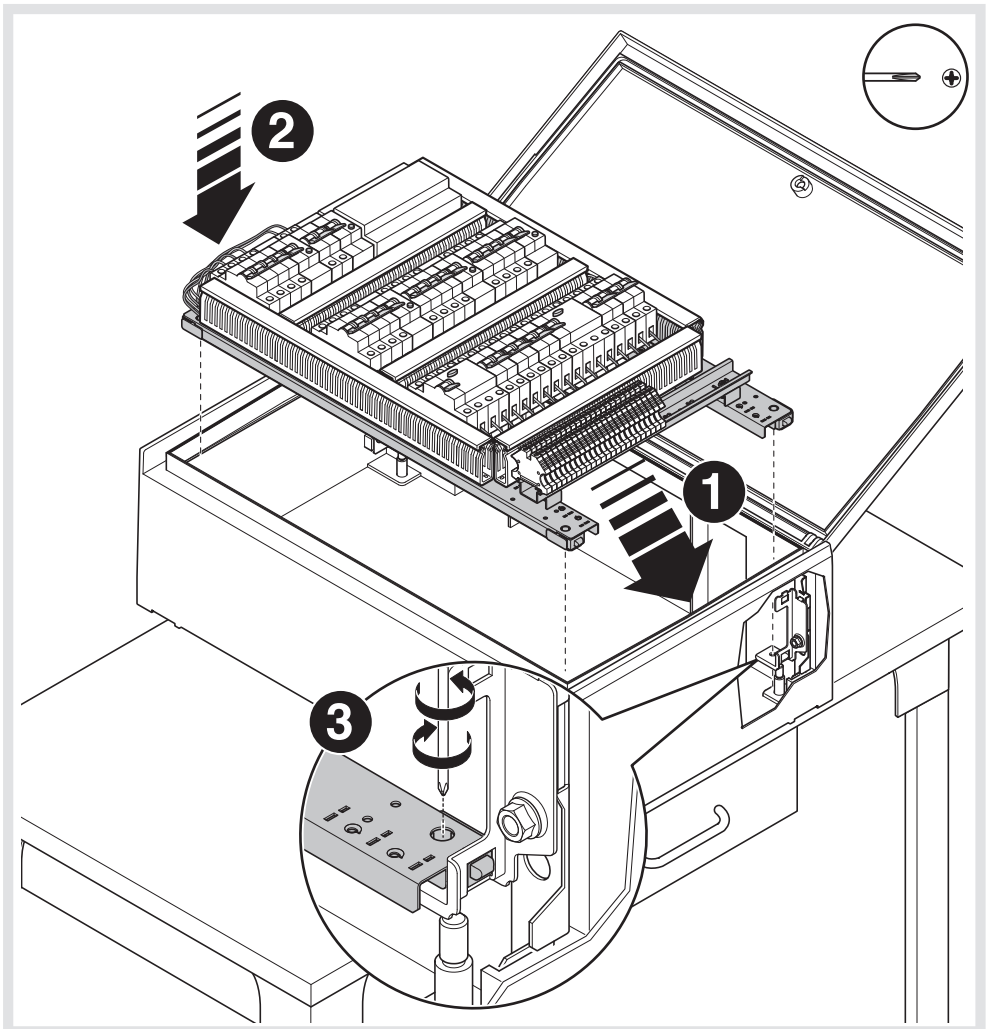

C

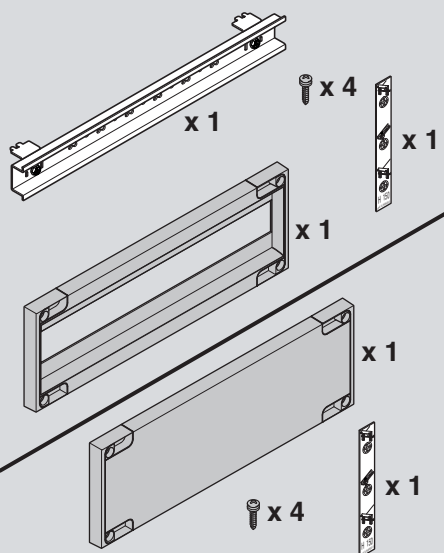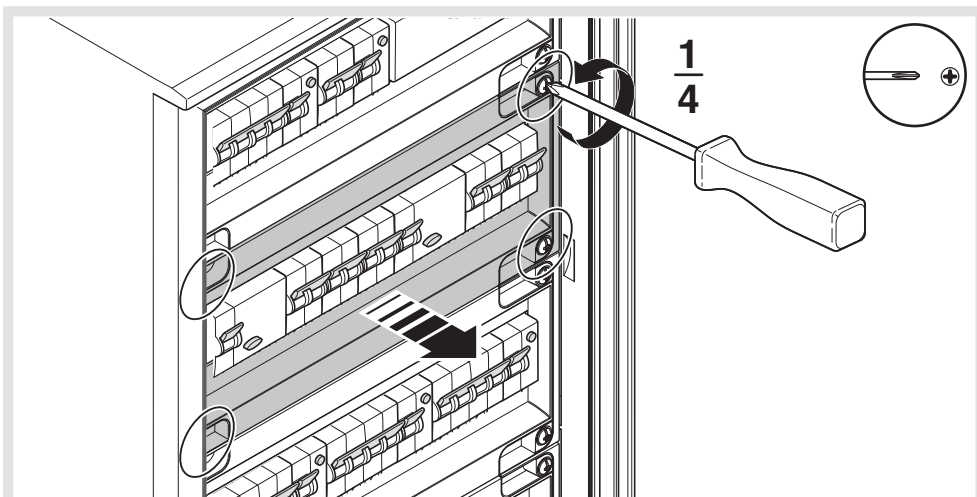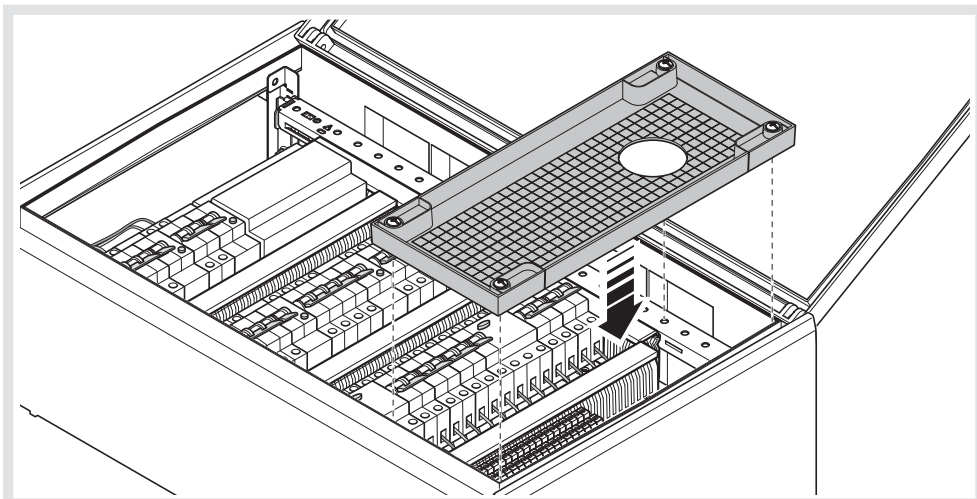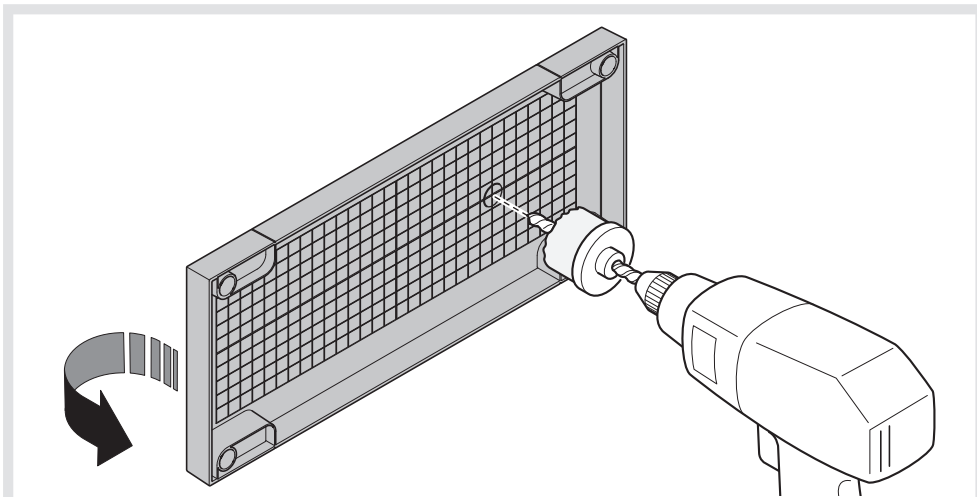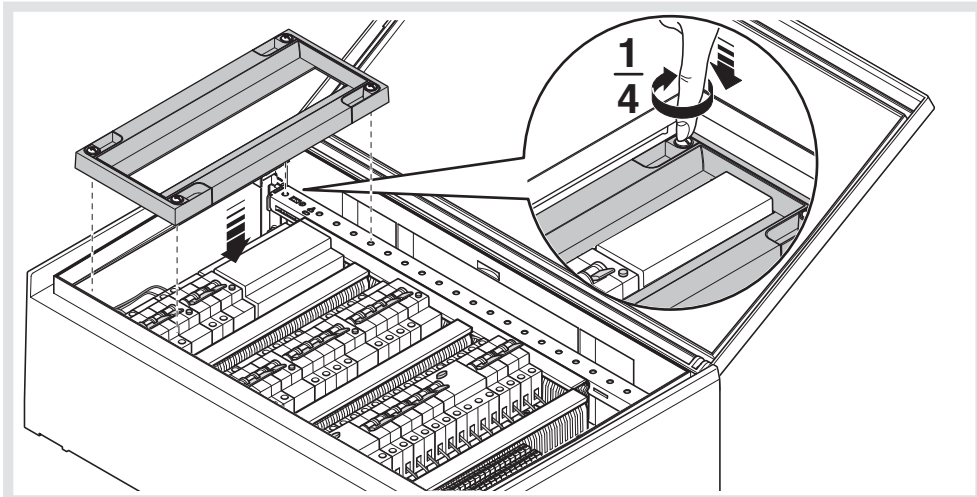


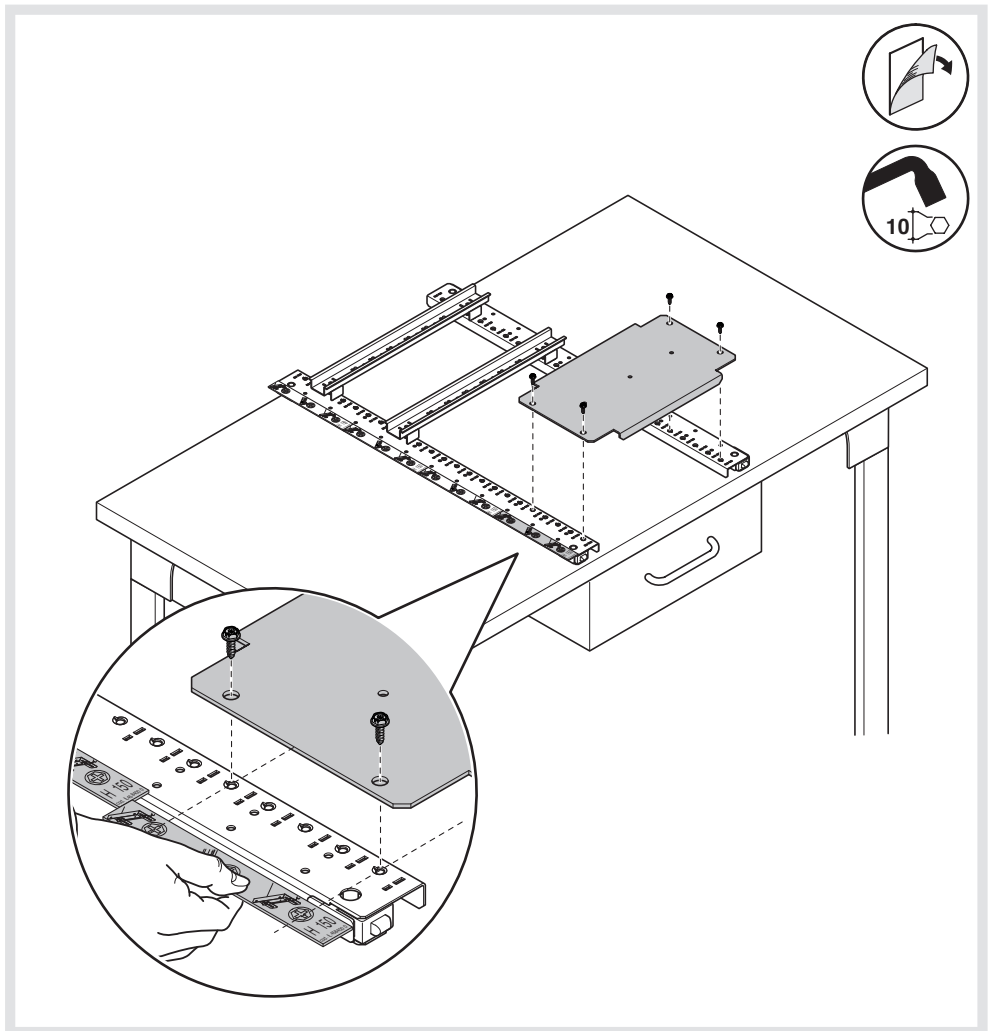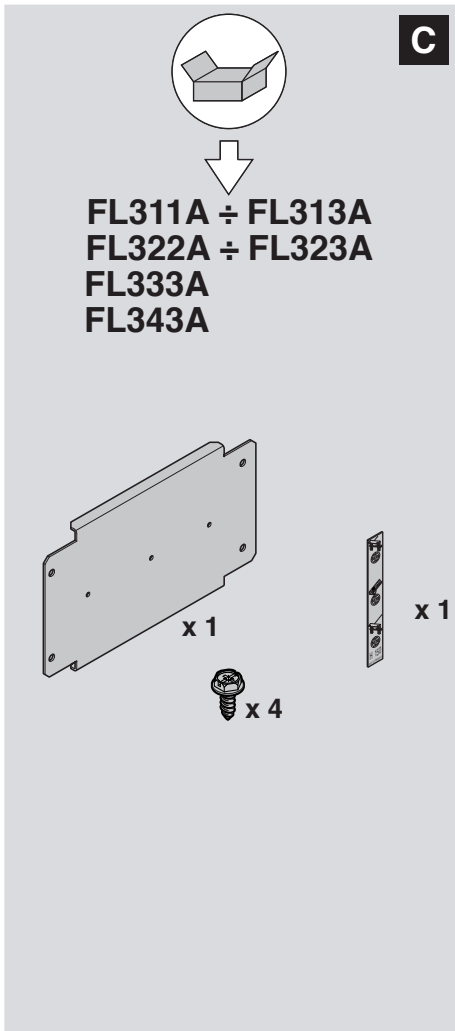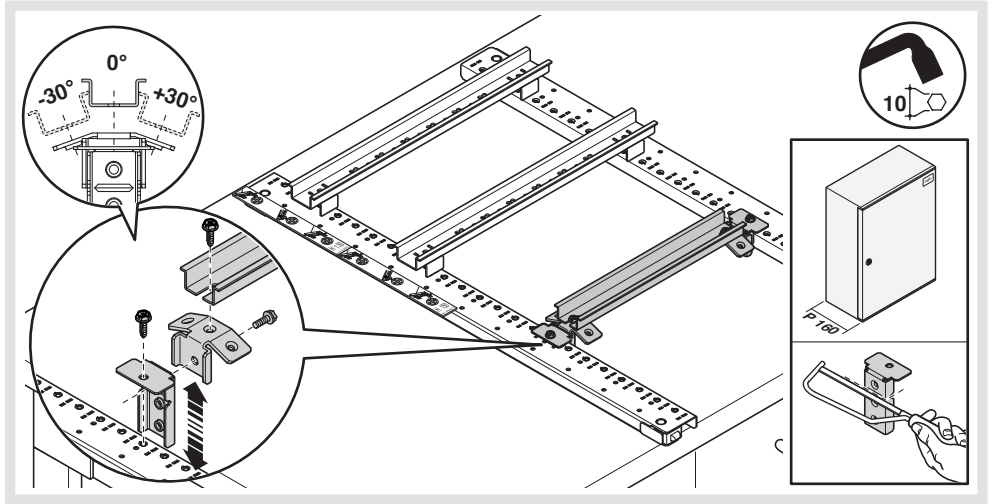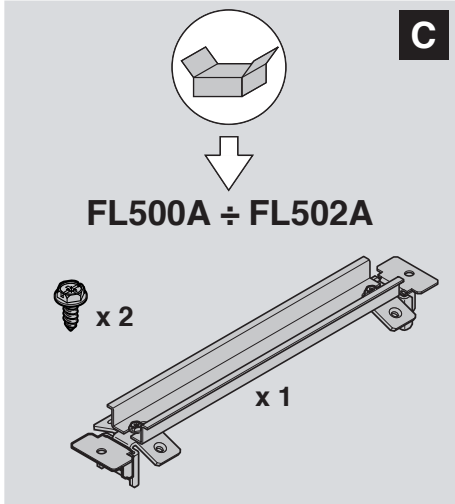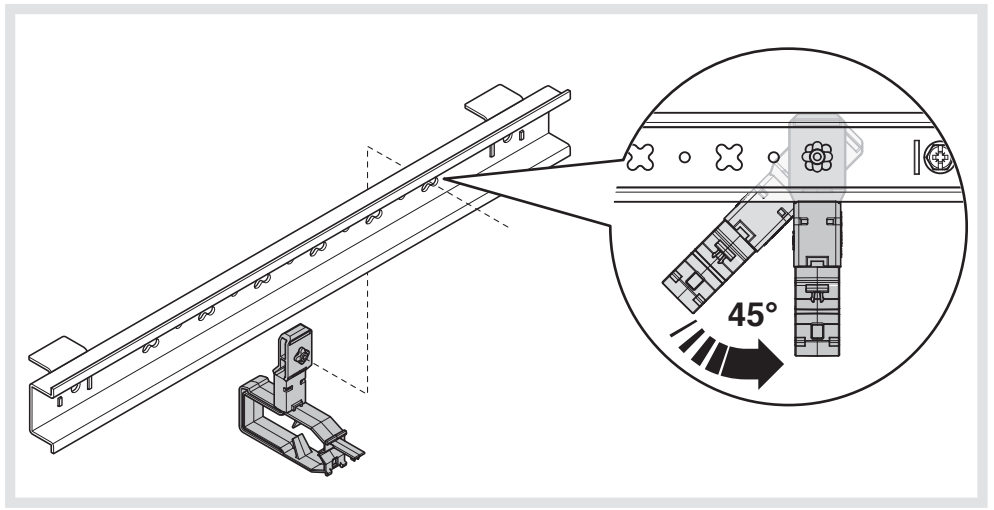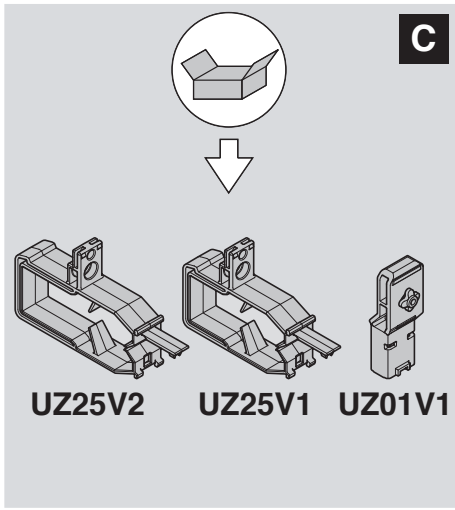



C

FL316A
FL326A
FL336A
FL346A

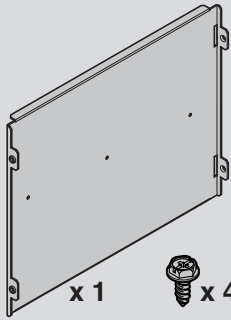


x 1



x 4



 
x 4



x 1




x 2

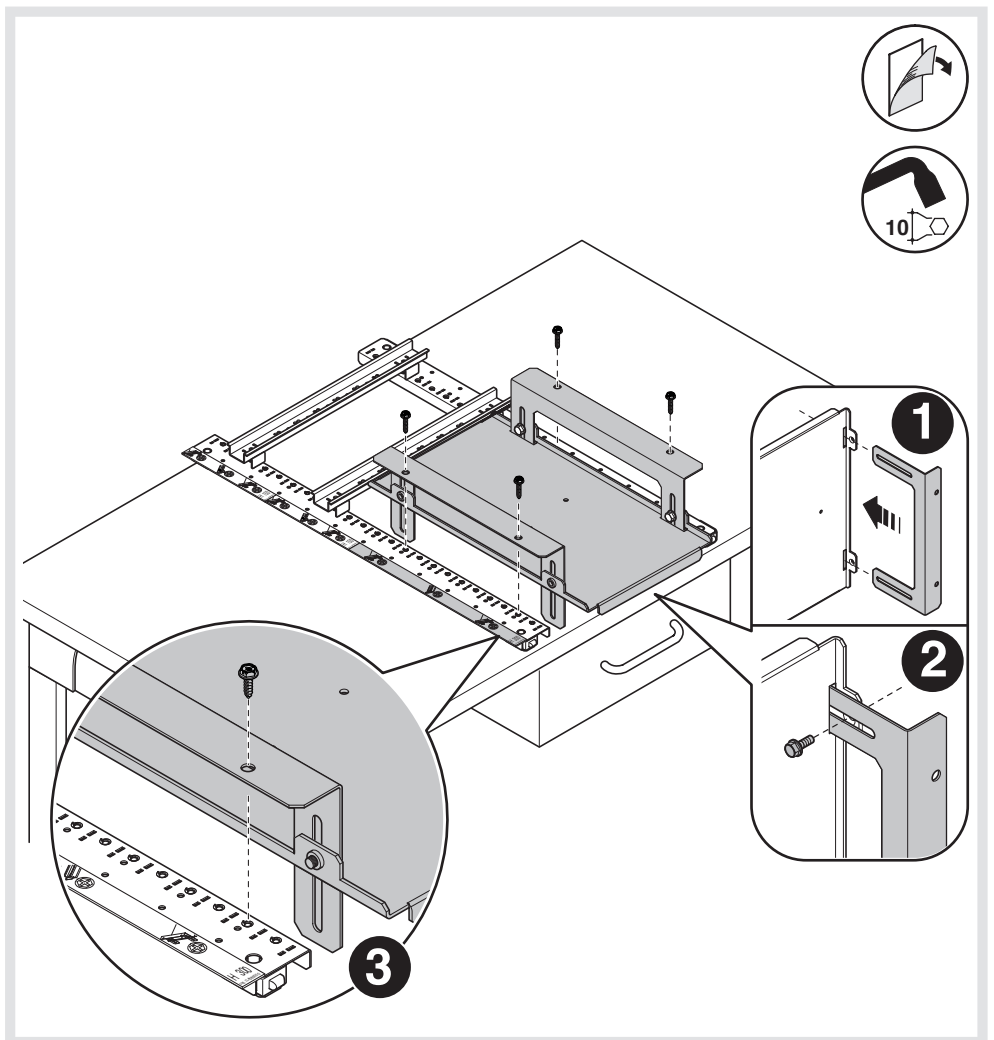


C

FL371A ÷ FL373A

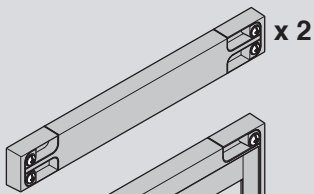

x 2

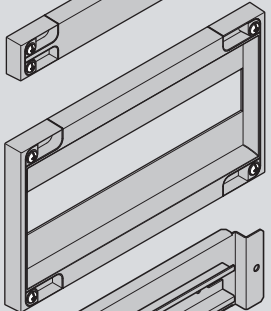

x 1





x 1




x 2







x 12

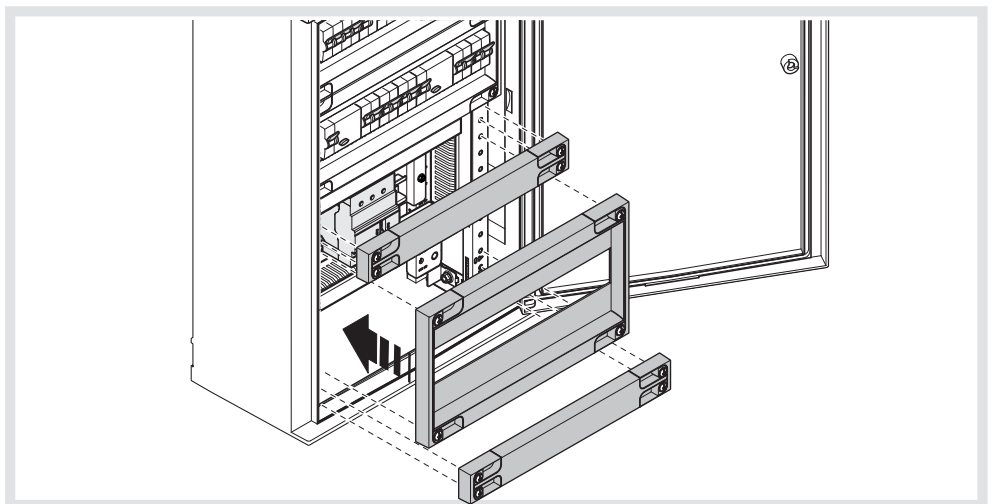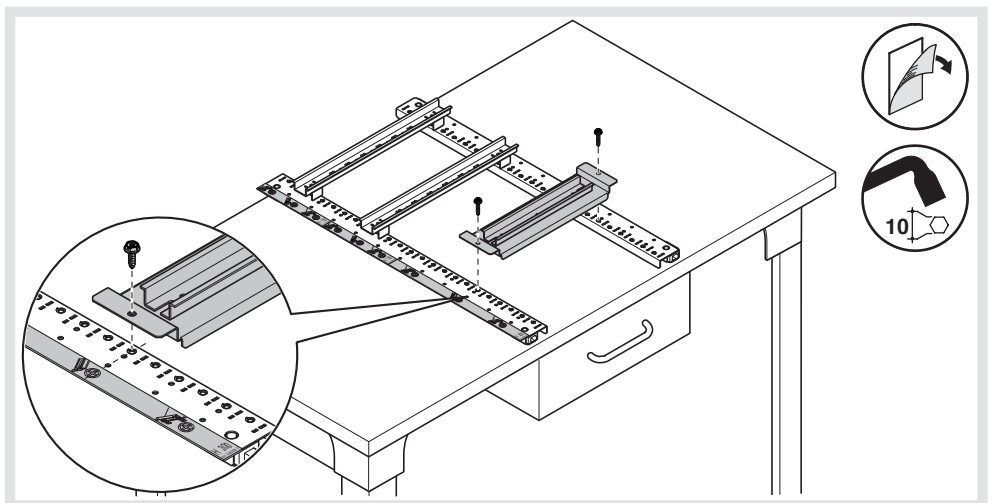






C






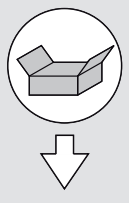




FL380AH

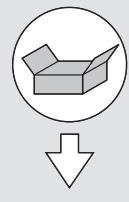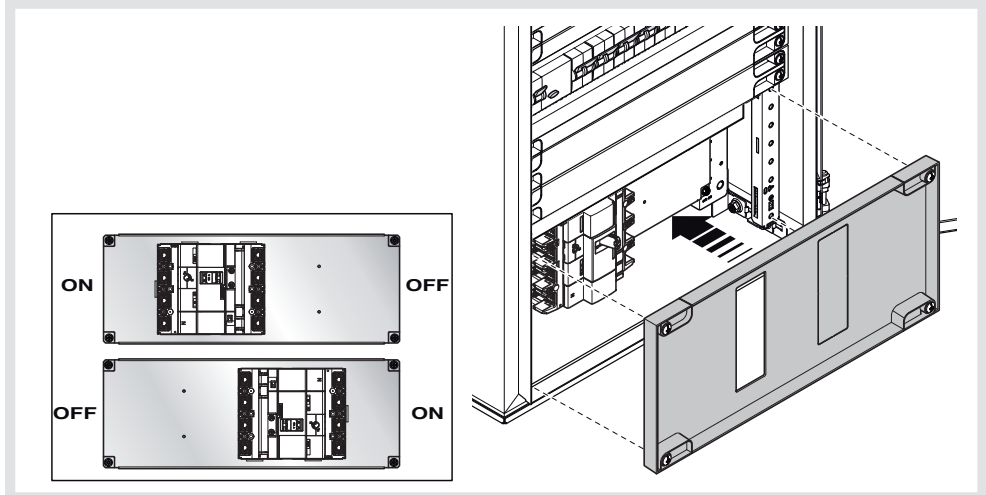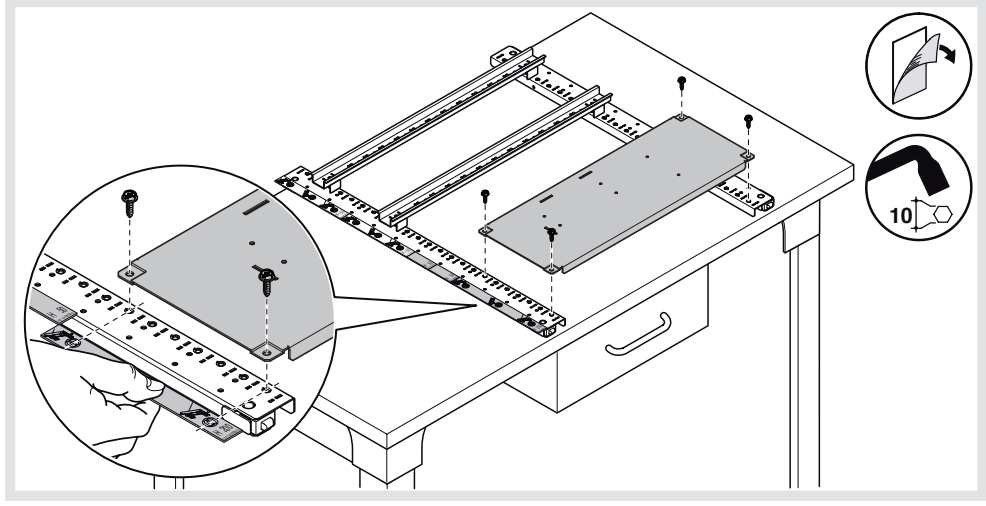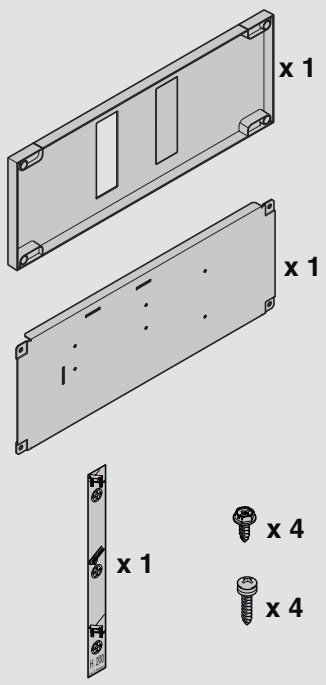

**FL391AH ÷ FL393AH
FL399AH**

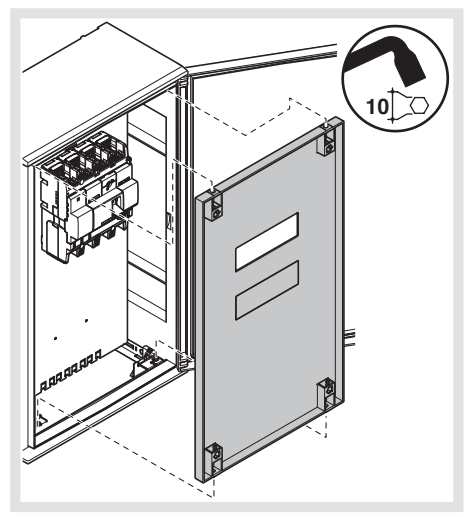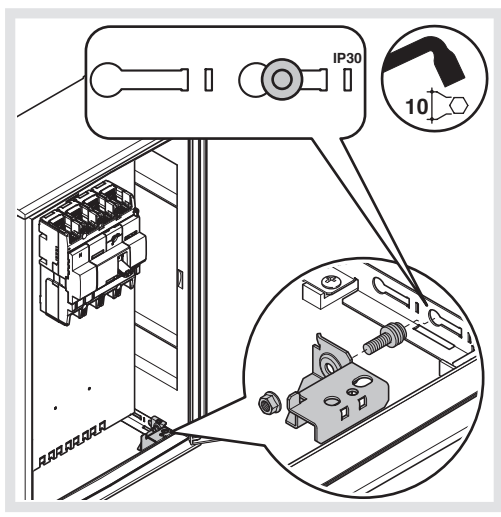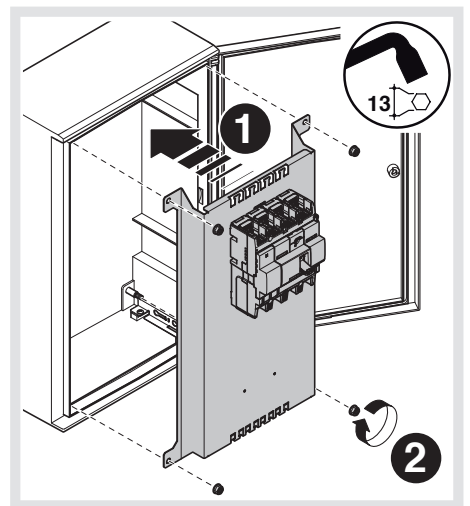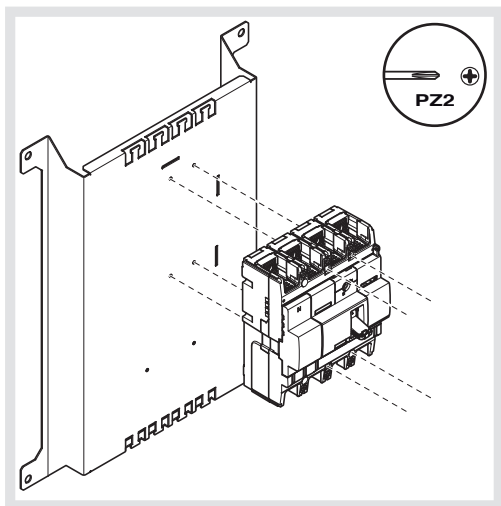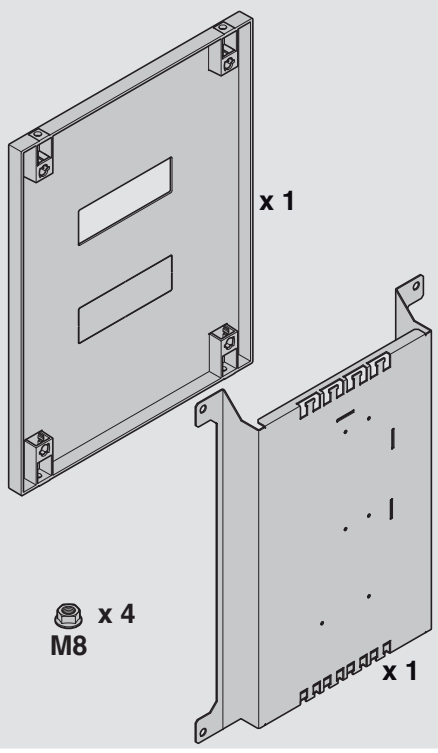

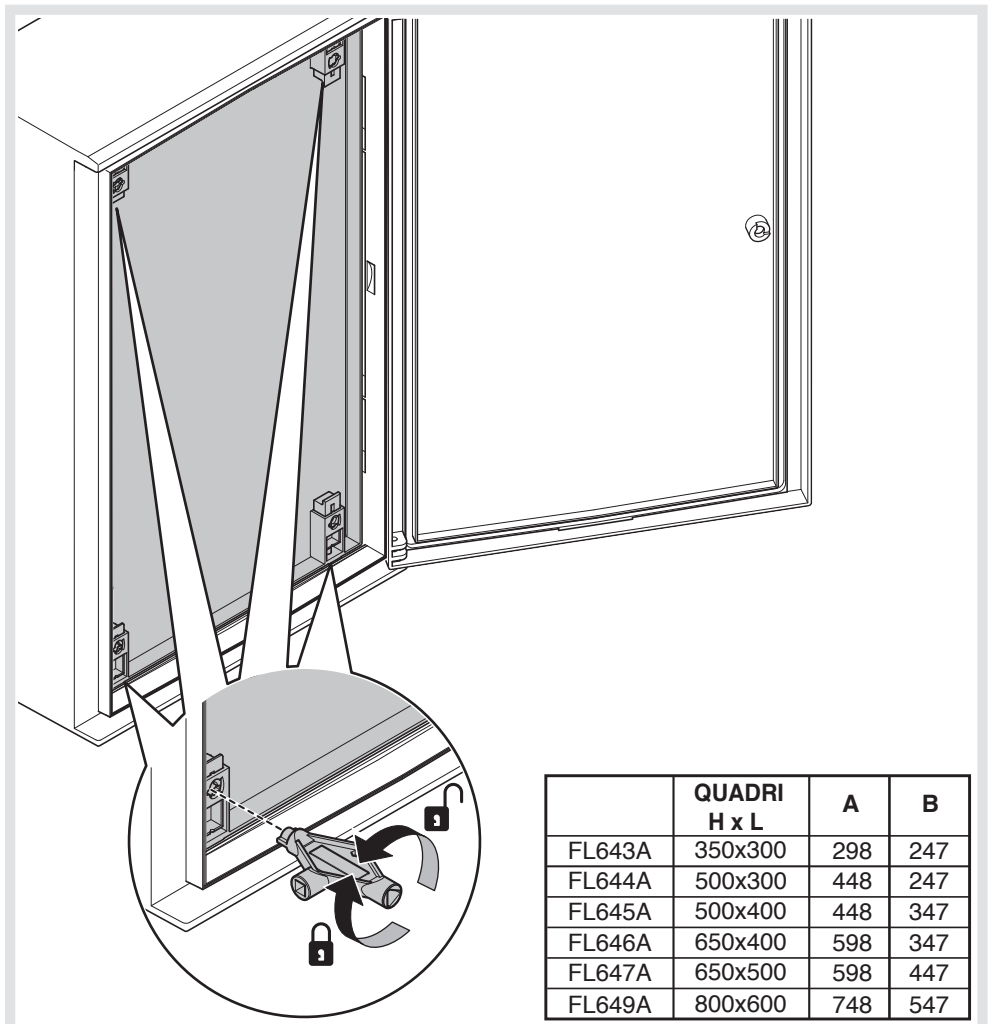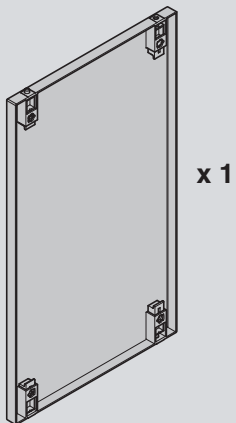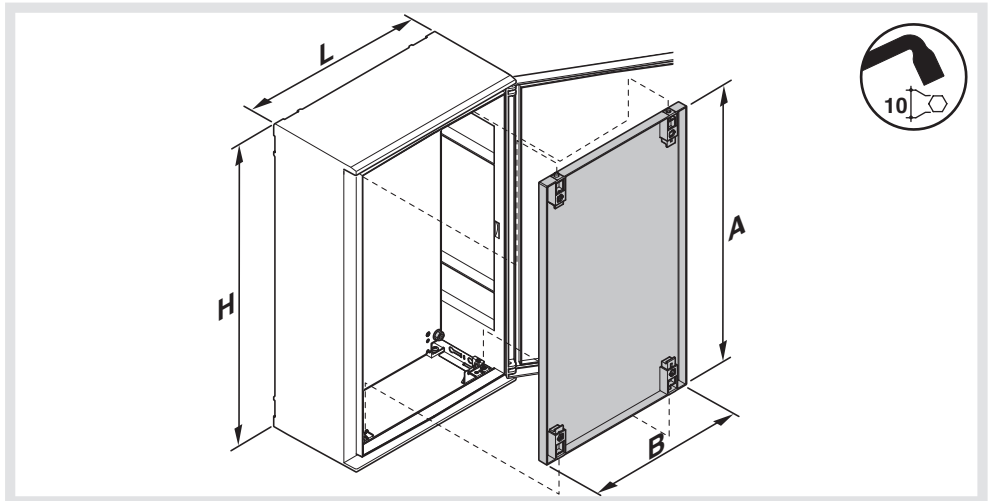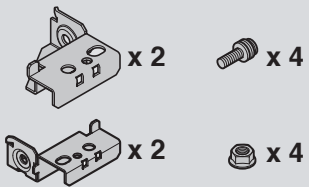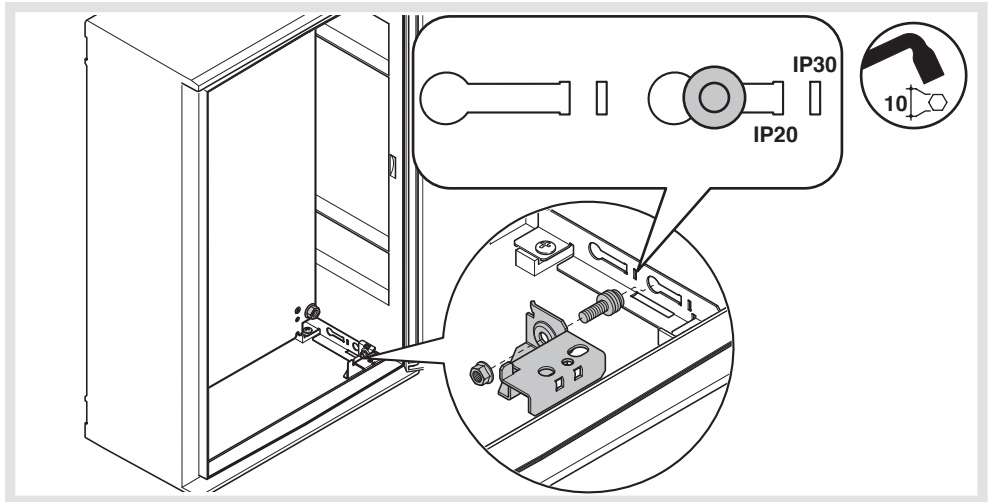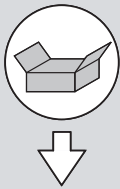

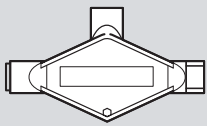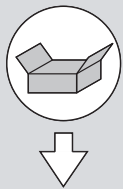

x 1

M8


x 4





x 4




x 4

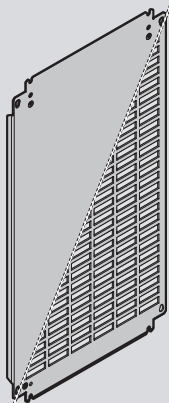

x 1

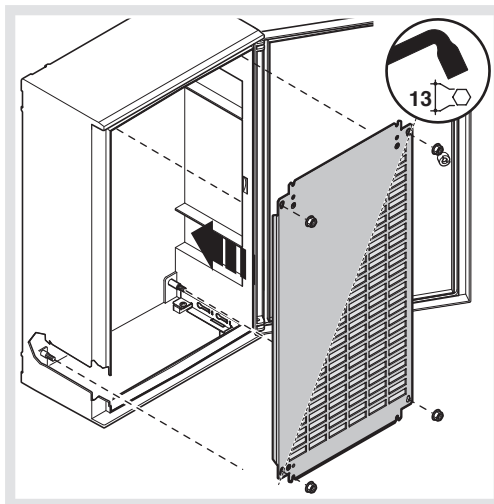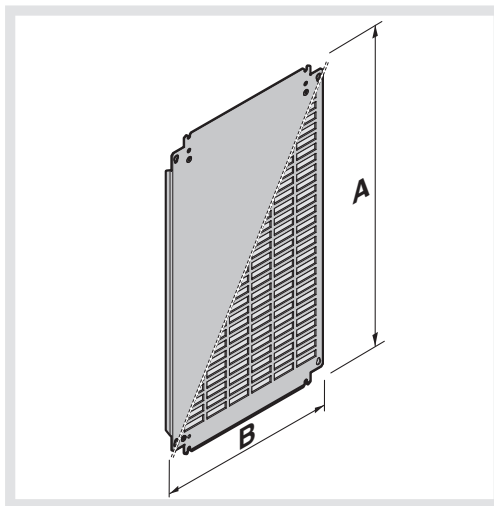

		QUADRI H X L	A	B
FL404A	FL473A	350x300	330	243
FL407A	FL474A	500x300	480	243
FL408A	FL475A	500x400	480	343
FL412A	FL476A	650x400	630	343
FL413A	FL477A	650x500	630	443
FL415A	FL479A	800x600	780	543

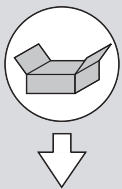

FL450A




x 4




x 4





x 4


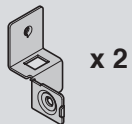


x 2


 


x 2




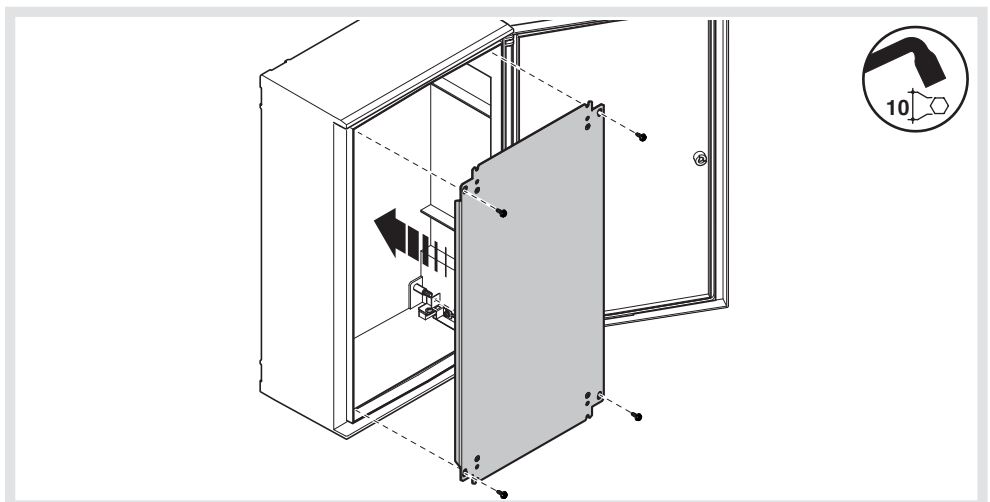
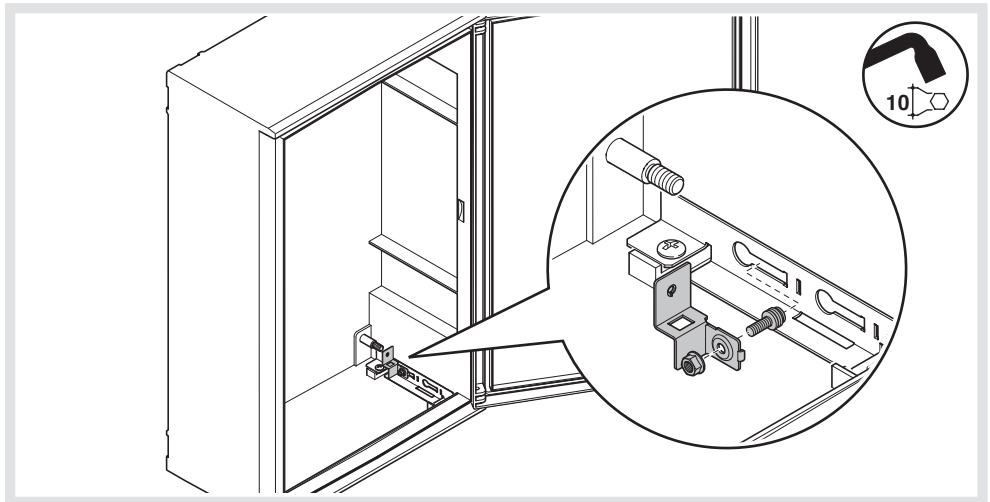


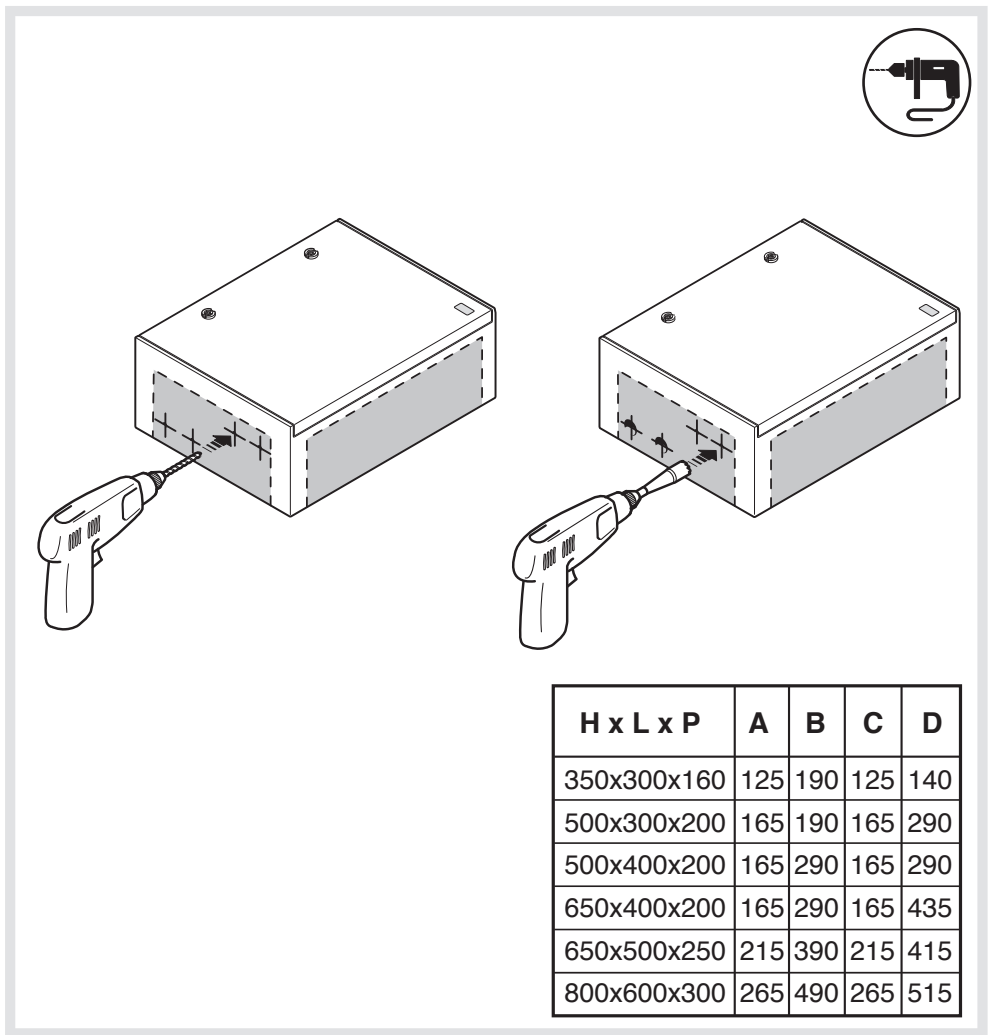
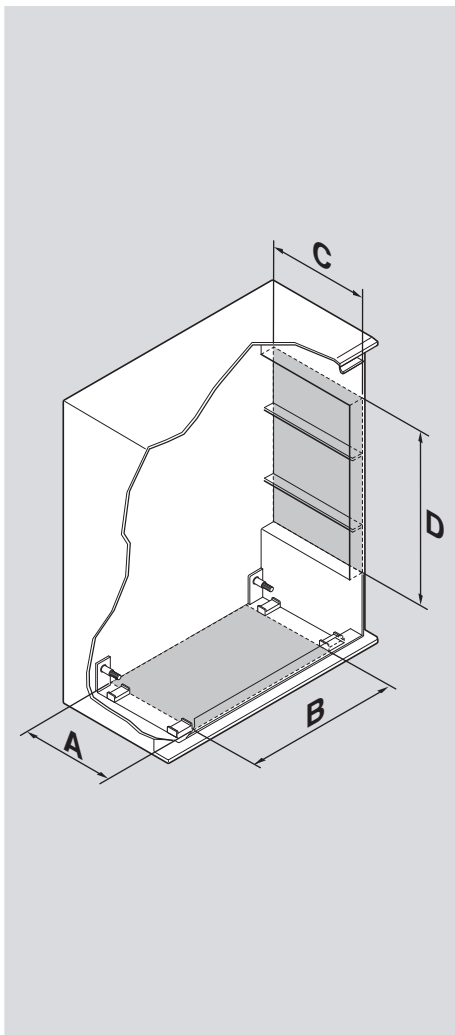


H x L x P	A	B	C	D
350x300x160	125	190	125	140
500x300x200	165	190	165	290
500x400x200	165	290	165	290
650x400x200	165	290	165	435
650x500x250	215	390	215	415
800x600x300	265	490	265	515

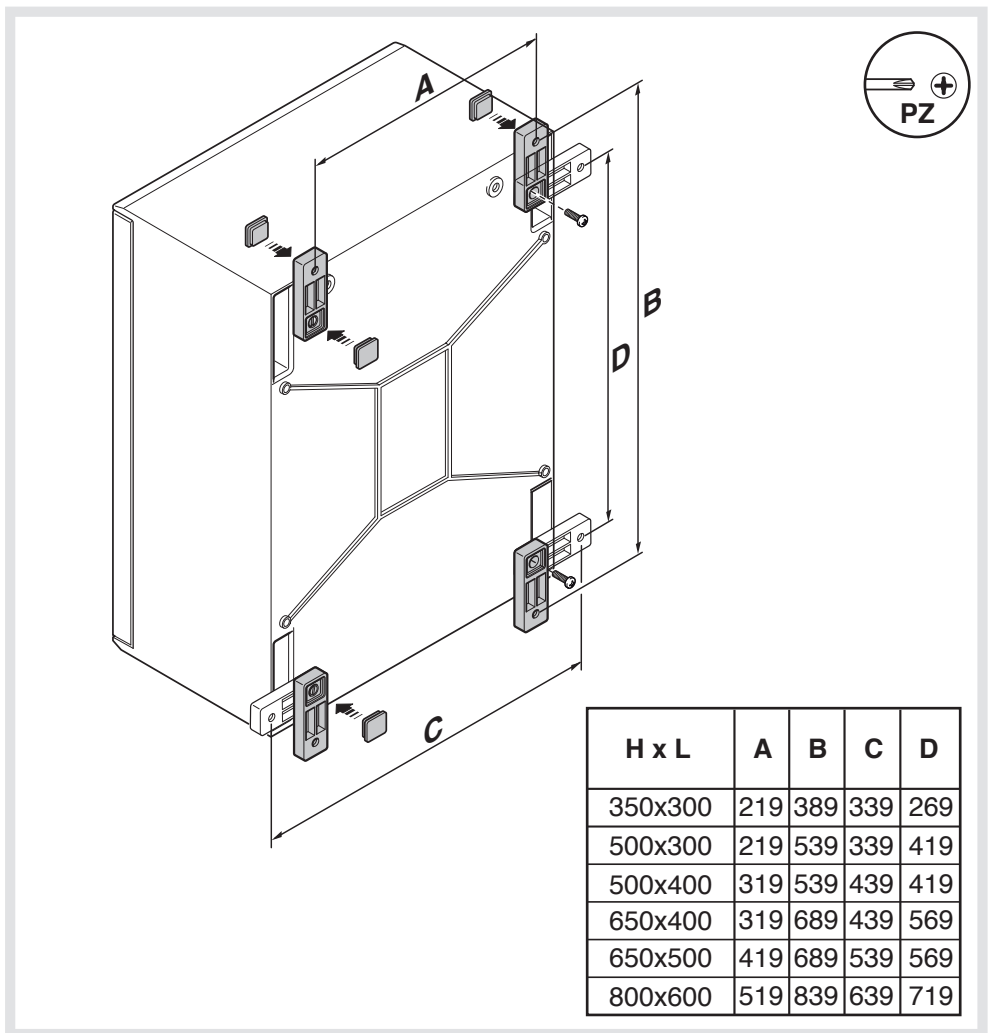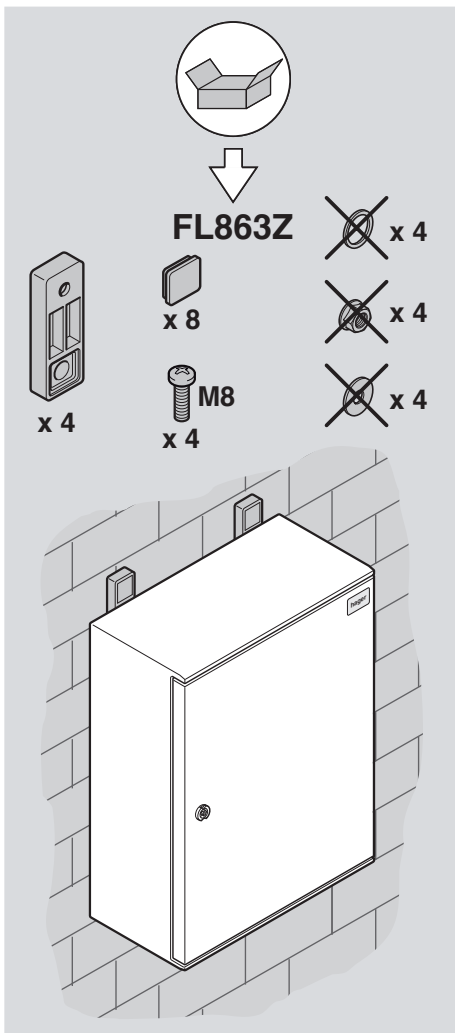

H x L	A	B	C	D
350x300	219	389	339	269
500x300	219	539	339	419
500x400	319	539	439	419
650x400	319	689	439	569
650x500	419	689	539	569
800x600	519	839	639	719

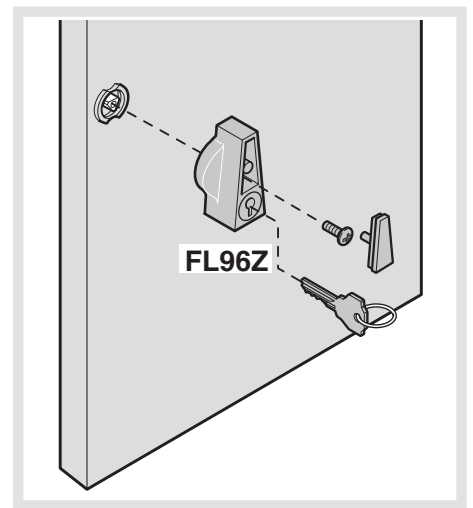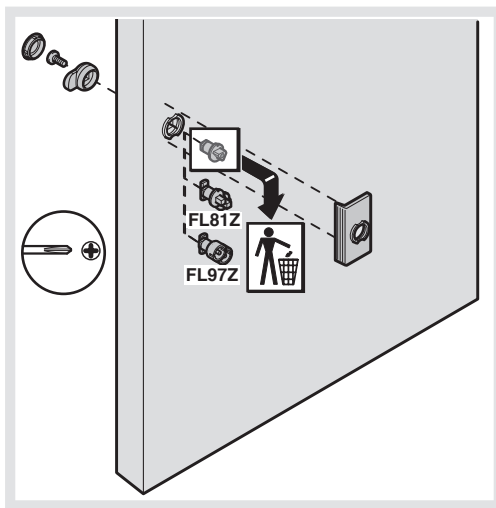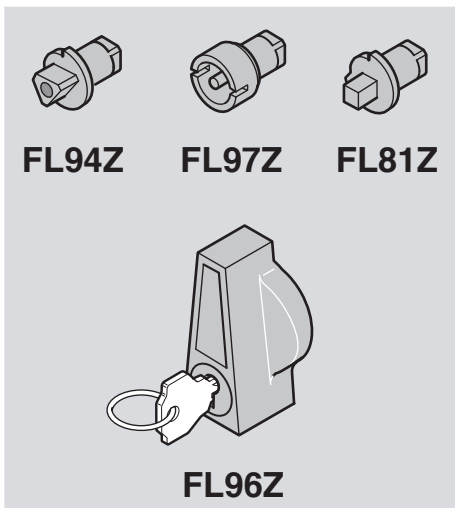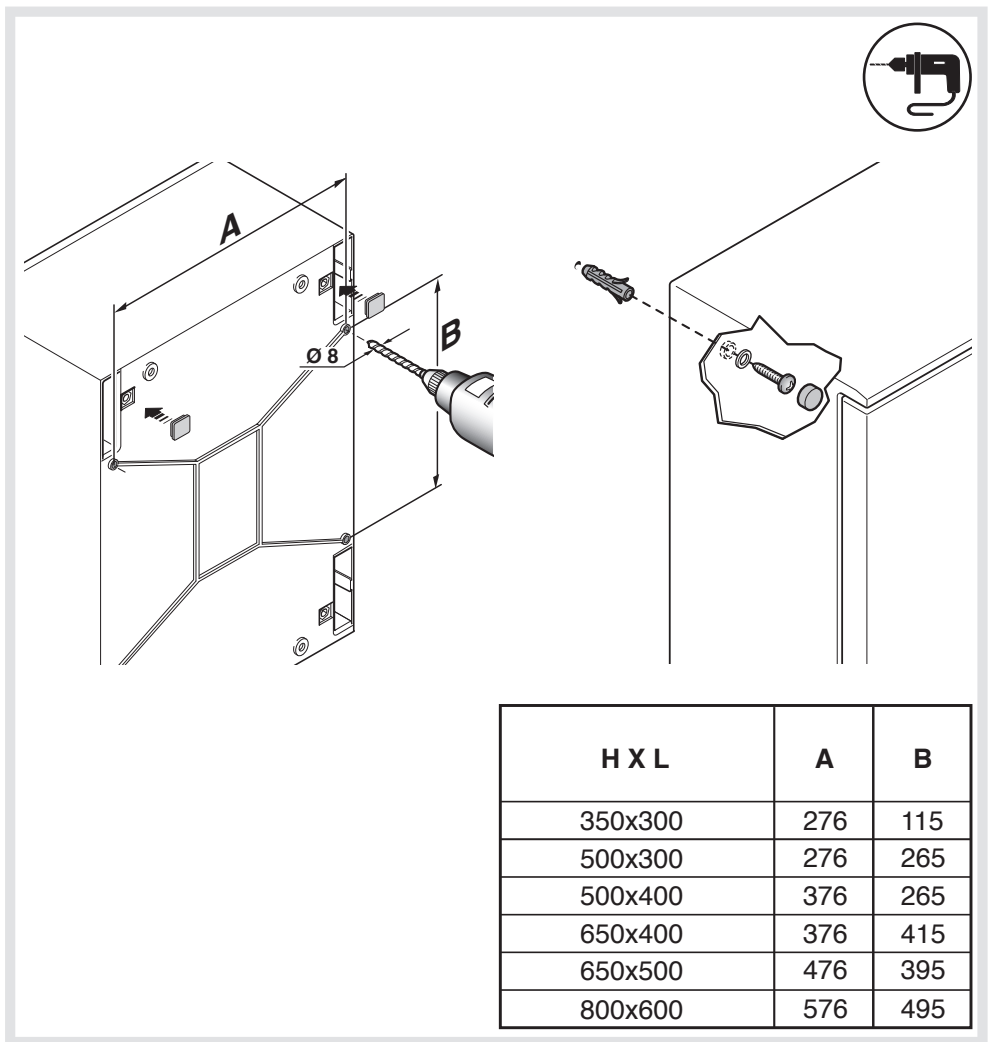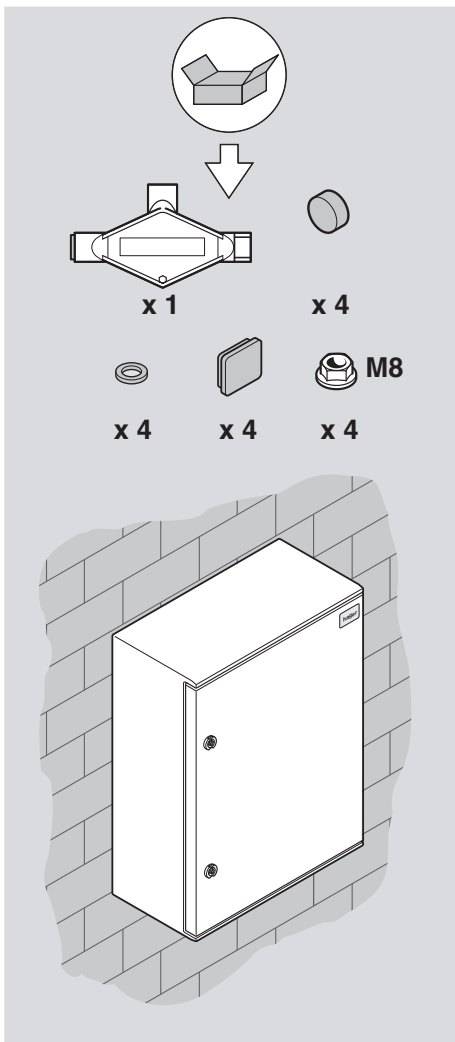

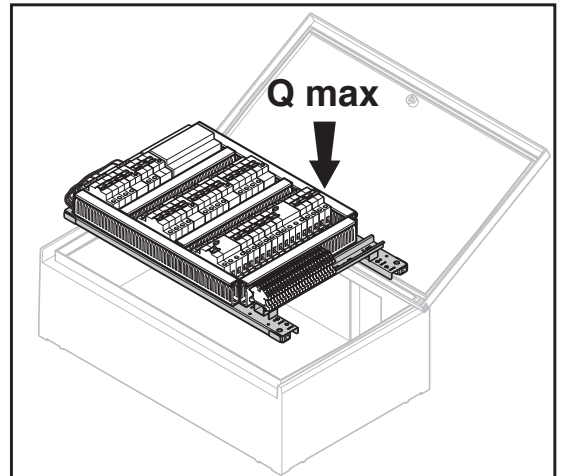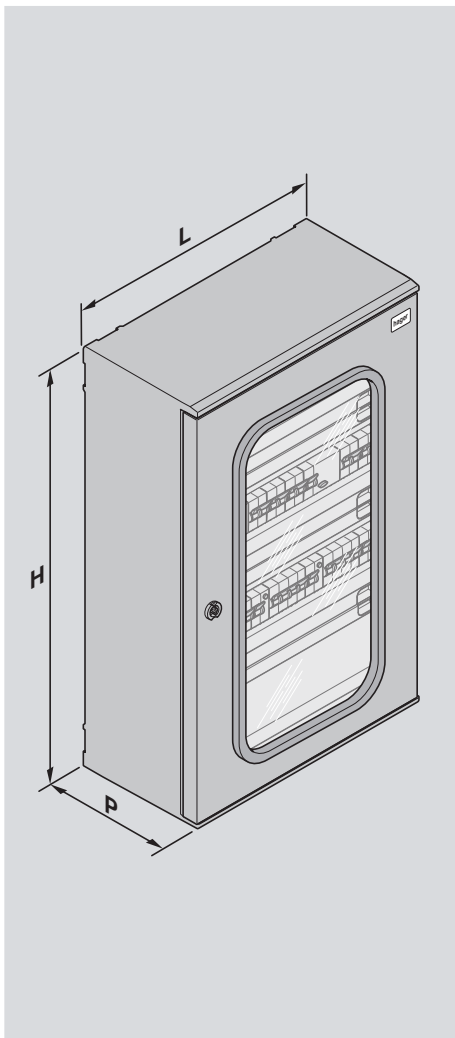

H	L	P	Q max Kg
350	300	160	15
500	300	200	21
500	400	200	28
650	400	200	37
650	500	250	46
800	600	300	68

