

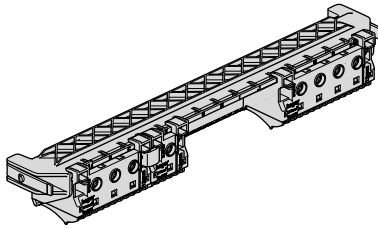


6LE001206B

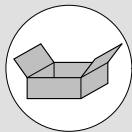

- | | | | |
|---|--------------------------|---|------------------------|
| Ⓓ | Montageanleitung | Ⓗ | Upute za montažu |
| Ⓕ | Notice d'instructions | Ⓗ | Szerelési útmutató |
| Ⓖ | Mounting instructions | Ⓕ | Montavimo instrukcija |
| Ⓝ | Montage instructie | Ⓕ | Montāžas instrukcija |
| Ⓓ | Monteringsvejledning | Ⓕ | Instrukcja montażowa |
| Ⓕ | Asennusohje | Ⓗ | Intructiuni de montare |
| Ⓝ | Montasjeanvisning | Ⓕ | Návod na montáž |
| Ⓔ | Monteringsinstruktioner | Ⓗ | Указания по установке |
| Ⓘ | Istruzioni di montaggio | Ⓕ | Инструкции за монтаж |
| Ⓔ | Instrucciones de montaje | Ⓕ | Οδηγίες χώνευσης |
| Ⓗ | Instruções de montagem | Ⓕ | Navodilo za montažo |
| Ⓕ | Montážní návod | Ⓗ | Paigaldusjuhised |
| Ⓕ | Uputstvo za montažu | Ⓕ | Leiðbeiningar |
| Ⓕ | Інструкції з установки | Ⓗ | دليل التركيب |

ERC

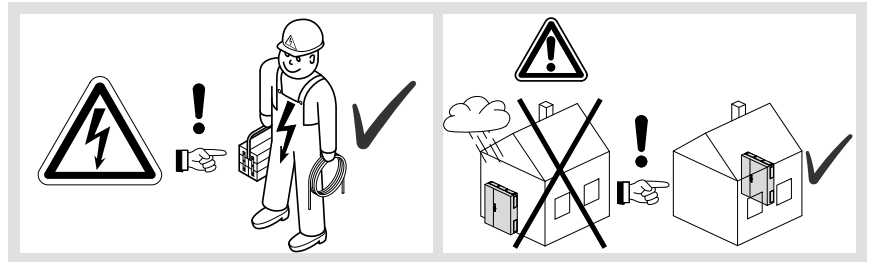

U_N: AC 230V / 50Hz
I_N: AC 63A
T: +40 / -5°C
IP2X

