







472.061.010c

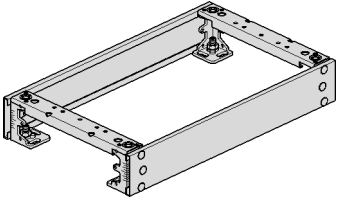

- ⒹⒺ Montageanleitung
- ⒻⓇ Notice d'instructions
- ⒼⒷ Mounting instructions
- ⓃⓁ Montage instructie
- ⒹⓀ Monteringsvejledning
- ⒻⓂ Asennusohje
- ⓃⓄ Montasjeanvisning
- ⒺⓈ Monterings instruktioner
- ⒾⓉ Istruzioni di montaggio
- ⒺⓈ Instrucciones de montaje
- ⓅⓉ Instruções de montagem
- ⒸⓏ Montážní návod
- Ⓑⓐ Uputstvo za montažu
- ⒼⓀ Інструкції з установки

- ⒽⓇ Upute za montažu
- ⒽⓊ Szerelési útmutató
- ⓁⓉ Montavimo instrukcija
- ⓁⓋ Montāžas instrukcija
- ⓅⓁ Instrukcja montażowa
- ⓇⓄ Instrucțiuni de montare
- ⒺⓀ Návod na montáž
- ⓇⓊ Указания по установке
- ⒷⒸ Инструкции за монтаж
- ⒼⓇ Οδηγίες χώνευσης
- ⒺⓂ Navodilo za montažo
- ⒺⒺ Paigaldusjuhised
- ⒾⓈ Leiðbeiningar
- ⒶⓇ دليل التركيب

ERC

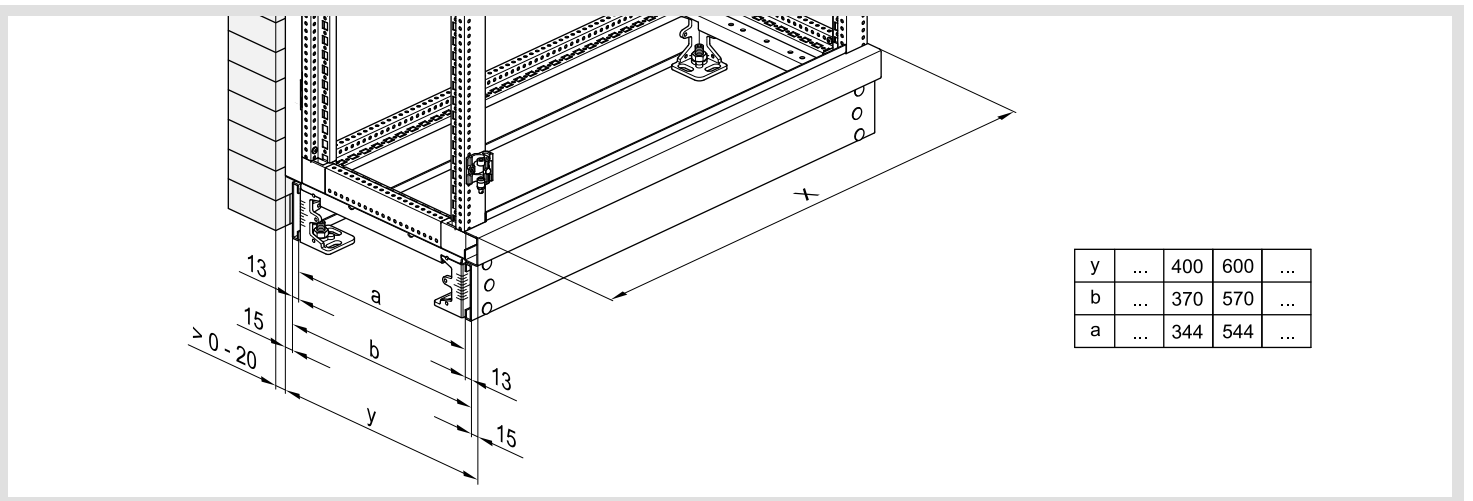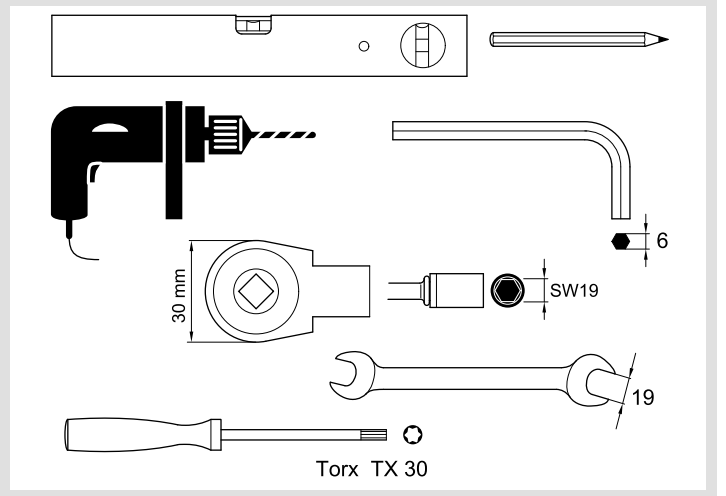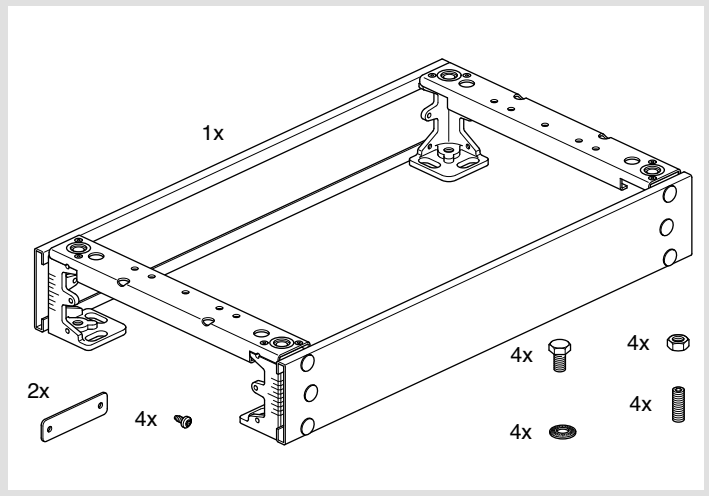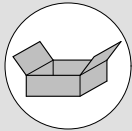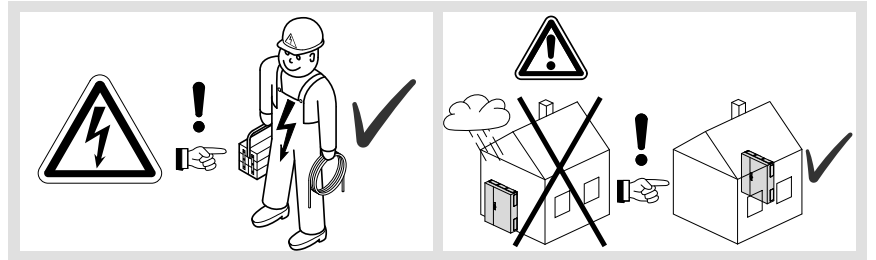

y	...	400	600	...
b	...	370	570	...
a	...	344	544	...

