

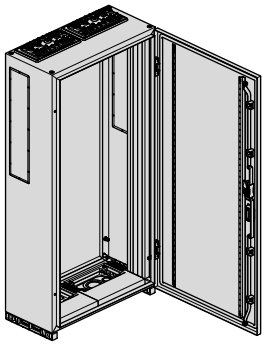
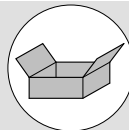


6LE002892D

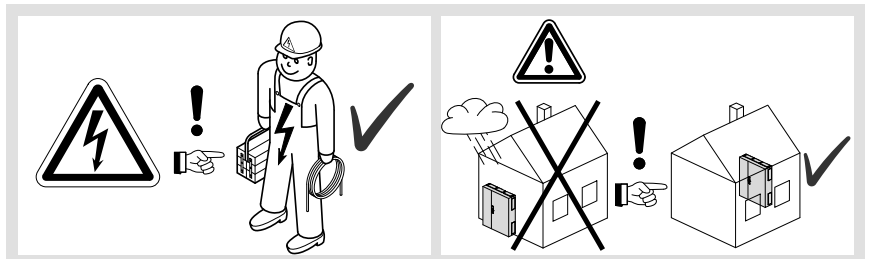


Univers IP5 VegaD IP5



- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu
- (UK) Інструкції з установки
- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Montāžas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Указания по установке
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar
- (AR) دليل التركيب

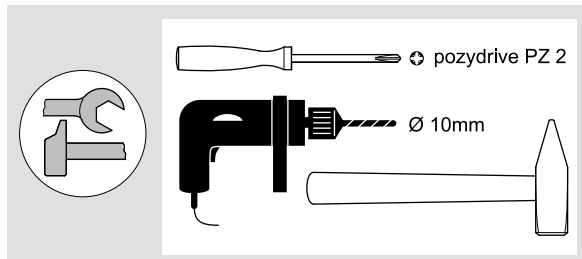


FV...

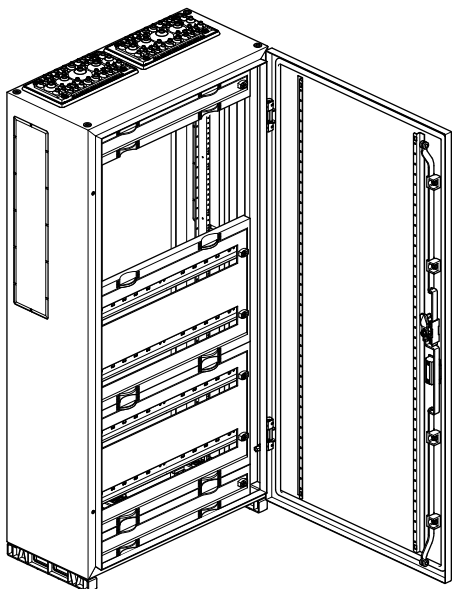


FR...

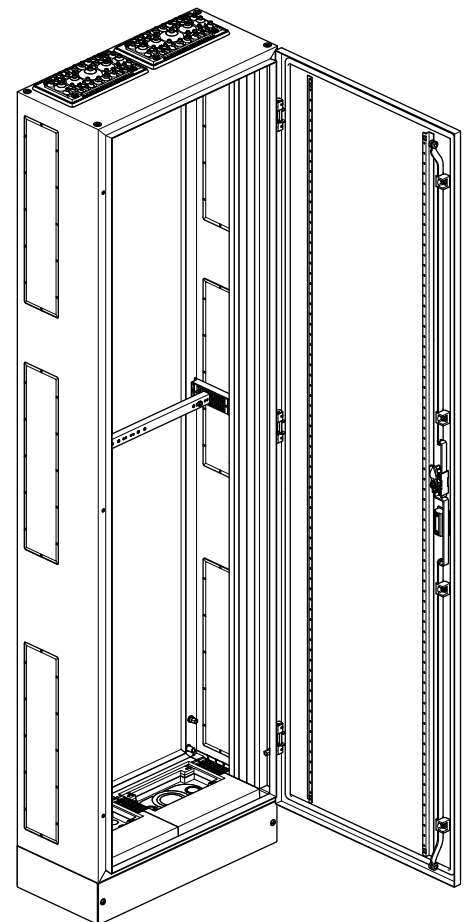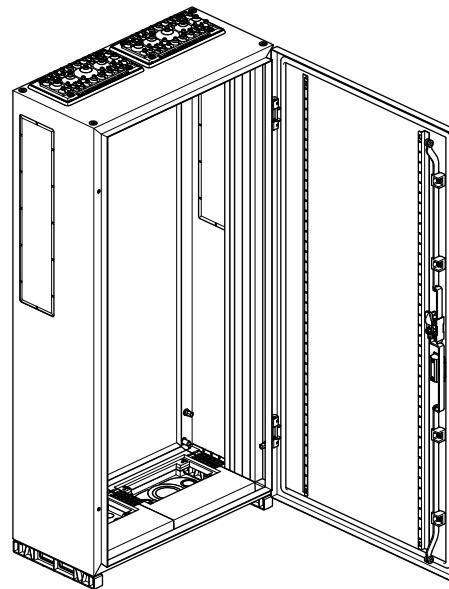


Tiefe / Depth	Höhe / Height	Breite / Width	mod.	Ref	Ref	Ref	X	Y	X1	Y1
275	500	300	36	FR31E	FR31S		245	540	340	410
	500	550	72	FR32E	FR32S	FV22A	495	540	590	410
	500	800	108	FR33E	FR33S		745	540	840	410
	500	1050	144	FR34E	FR34S		995	540	1090	410
	500	1300	180	FR35E	FR35S		1245	540	1340	410
	650	300	48	FR41E	FR41S		245	690	340	560
	650	550	96	FR42E	FR42S	FV32A	495	690	590	560
	650	800	144	FR43E	FR43S		745	690	840	560
	650	1050	192	FR44E	FR44S		995	690	1090	560
	650	1300	240	FR45E	FR45S		1245	690	1340	560
	800	300	60	FR51E	FR51S		245	840	340	710
	800	550	120	FR52E	FR52S	FV42A	495	840	590	710
	800	800	180	FR53E	FR53S		745	840	840	710
	800	1050	240	FR54E	FR54S		995	840	1090	710
	800	1300	300	FR55E	FR55S		1245	840	1340	710
	950	300	72	FR61E	FR61S		245	990	340	860
	950	550	144	FR62E	FR62S	FV52A	495	990	590	860
	950	800	216	FR63E	FR63S		745	990	840	860
	950	1050	288	FR64E	FR64S		995	990	1090	860
	950	1300	360	FR65E	FR65S		1245	990	1340	860
	1100	300	84	FR71E	FR71S		245	1140	340	1010
	1100	550	168	FR72E	FR72S	FV62A	495	1140	590	1010
	1100	800	252	FR73E	FR73S		745	1140	840	1010
	1100	1050	336	FR74E	FR74S		995	1140	1090	1010
	1100	1300	420	FR75E	FR75S		1245	1140	1340	1010
	1250	300	96	FR81E	FR81S		245	1290	340	1160
	1250	550	192	FR82E	FR82S	FV72A	495	1290	590	1160
	1250	800	288	FR83E	FR83S		745	1290	840	1160
	1250	1050	384	FR84E	FR84S		995	1290	1090	1160
	1250	1300	480	FR85E	FR85S		1245	1290	1340	1160
	1400	300	108	FR91E	FR91S		245	1440	340	1310
	1400	550	216	FR92E	FR92S		495	1440	590	1310
	1400	800	324	FR93E	FR93S		745	1440	840	1310
	1400	1050	432	FR94E	FR94S		995	1440	1090	1310
	1400	1300	540	FR95E	FR95S		1245	1440	1340	1310
	1550	300	108	FR01E	FR01S		245	1590	340	1460
	1550	550	216	FR02E	FR02S		495	1590	590	1460
	1550	800	324	FR03E	FR03S		745	1590	840	1460
	1550	1050	432	FR04E	FR04S		995	1590	1090	1460
	1550	1300	540	FR05E	FR05S		1245	1590	1340	1460
400	1400	300	216	FR92G	FR92H		495	1440	590	1310
400	1400	550	324	FR93G	FR93H		745	1440	840	1310
400	1400	800	432	FR94G	FR94H		995	1440	1090	1310

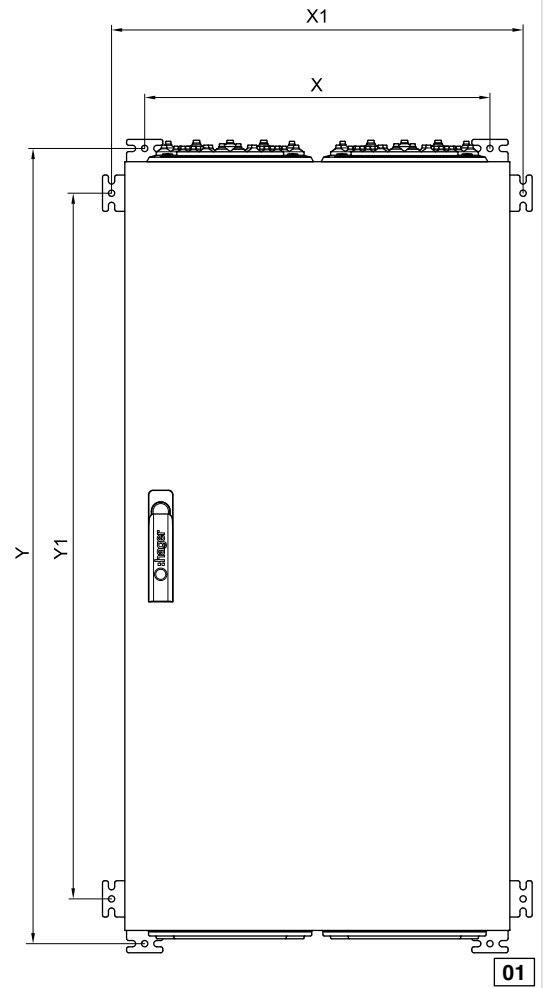


01

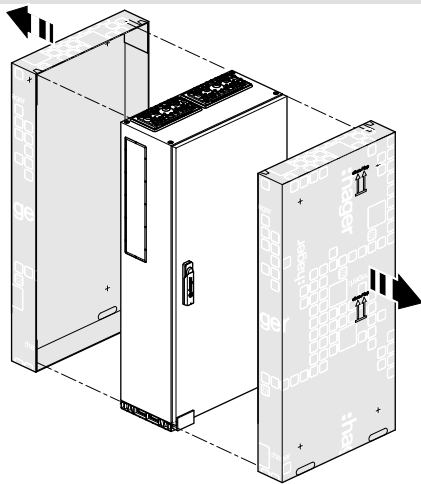


02

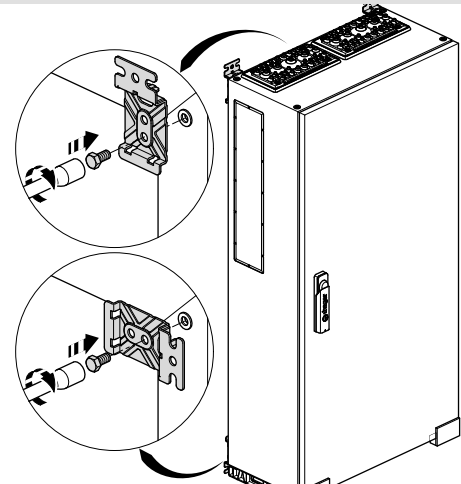


03

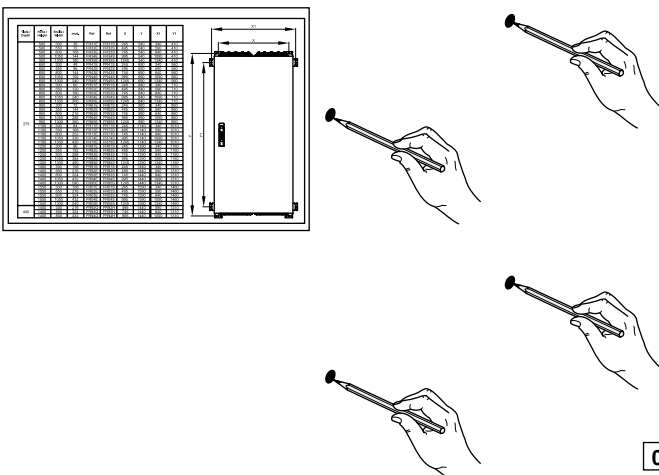


04

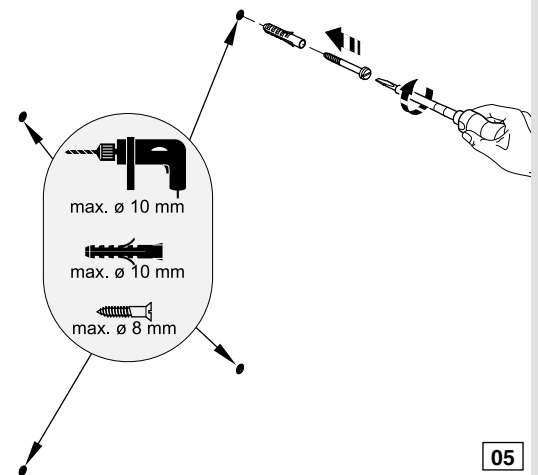

05

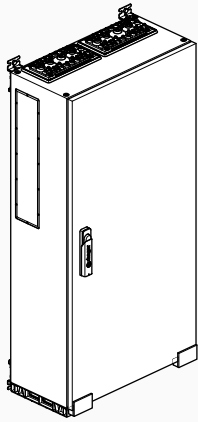


06

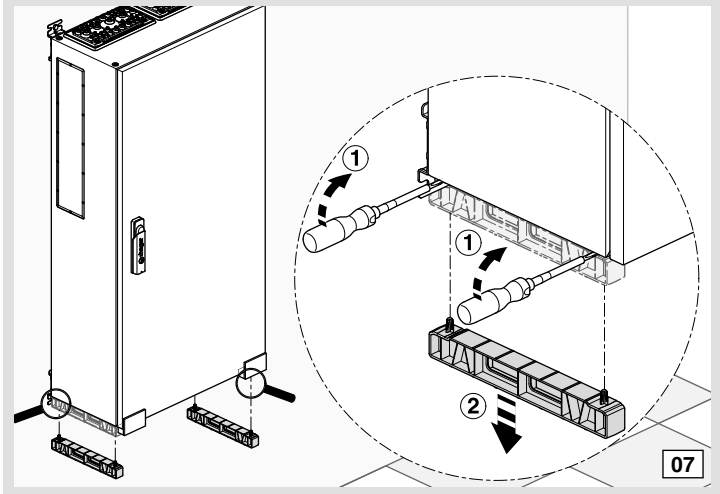

07

Tiefe / Depth	Höhe / Height	Breite / Width	mod.	Ref	Ref	Ref	Ref	X	Y	X1	Y1	Z
275	1700	300	132	FR11E1		FR11S1		245	1721	340	1656	100
	1700	550	264	FR12E1		FR12S1		495	1721	590	1656	100
	1700	800	396	FR13E1		FR13S1		745	1721	840	1656	100
	1700	1050	528	FR14E1		FR14S1		995	1721	1090	1656	100
	1700	1300	660	FR15E1		FR15S1		1245	1721	1340	1656	100
275	1850	300	144	FR21E1		FR21S1		245	1871	340	1806	100
	1850	550	288	FR22E1	FR22K1	FR22S1	FR22L1	495	1871	590	1806	100
	1850	800	432	FR23E1	FR23K1	FR23S1	FR23L1	745	1871	840	1806	100
	1850	1050	576	FR24E1	FR24K1	FR24S1	FR24L1	995	1871	1090	1806	100
	1850	1300	720	FR25E1	FR25K1	FR25S1	FR25L1	1245	1871	1340	1806	100
400	1850	1550	864	FR26E1	FR26K1	FR26S1	FR26L1	1495	1871	1590	1806	100
	1850	300	144	FR21G1		FR21H1		245	1871	340	1806	100
	1850	550	288	FR22G1	FR22V1	FR22H1	FR22U1	495	1871	590	1806	100
	1850	800	432	FR23G1	FR23V1	FR23H1	FR23U1	745	1871	840	1806	100
	1850	1050	576	FR24G1	FR24V1	FR24H1	FR24U1	995	1871	1090	1806	100
400	1850	1300	720	FR25G1	FR25V1	FR25H1	FR25U1	1245	1871	1340	1806	100
	1850	1550	864	FR26G1	FR26V1	FR26H1	FR26U1	1495	1871	1590	1806	100

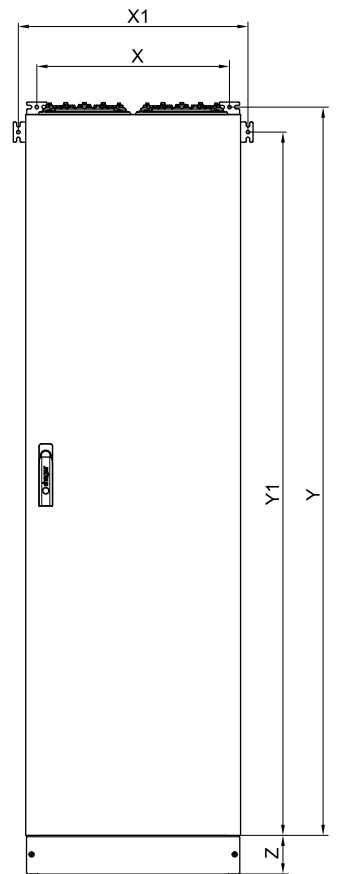


08












Tiefe / Depth	Höhe / Height	Breite / Width	mod.	Ref	Ref	Ref	Ref	X	Y	X1	Y1	Z
275	1700	300	132	FR11E2		FR11S2		245	1721	340	1656	200
	1700	550	264	FR12E2		FR12S2		495	1721	590	1656	200
	1700	800	396	FR13E2		FR13S2		745	1721	840	1656	200
	1700	1050	528	FR14E2		FR14S2		995	1721	1090	1656	200
	1700	1300	660	FR15E2		FR15S2		1245	1721	1340	1656	200
275	1850	300	144	FR21E2		FR21S2		245	1871	340	1806	200
	1850	550	288	FR22E2	FR22K2	FR22S2	FR22L2	495	1871	590	1806	200
	1850	800	432	FR23E2	FR23K2	FR23S2	FR23L2	745	1871	840	1806	200
	1850	1050	576	FR24E2	FR24K2	FR24S2	FR24L2	995	1871	1090	1806	200
	1850	1300	720	FR25E2	FR25K2	FR25S2	FR25L2	1245	1871	1340	1806	200
400	1850	1550	864	FR26E2	FR26K2	FR26S2	FR26L2	1495	1871	1590	1806	200
	1850	300	144	FR21G2		FR21H2		245	1871	340	1806	200
	1850	550	288	FR22G2	FR22V2	FR22H2	FR22U2	495	1871	590	1806	200
	1850	800	432	FR23G2	FR23V2	FR23H2	FR23U2	745	1871	840	1806	200
	1850	1050	576	FR24G2	FR24V2	FR24H2	FR24U2	995	1871	1090	1806	200
400	1850	1300	720	FR25G2	FR25V2	FR25H2	FR25U2	1245	1871	1340	1806	200
	1850	1550	864	FR26G2	FR26V2	FR26H2	FR26U	1495	1871	1590	1806	200










W Breite/ Width	D Tiefe/ Depth	H Höhe / Height	A	B
302	250	100	200	272
552	250	100	200	522
802	250	100	200	772
1052	250	100	200	1022
1302	250	100	200	1272
1552	250	100	200	1522










W Breite/ Width	D Tiefe/ Depth	H Höhe / Height	A	B
302	375	100	200	272
552	375	100	200	522
802	375	100	200	772
1052	375	100	200	1022
1302	375	100	200	1272
1552	375	100	200	1522

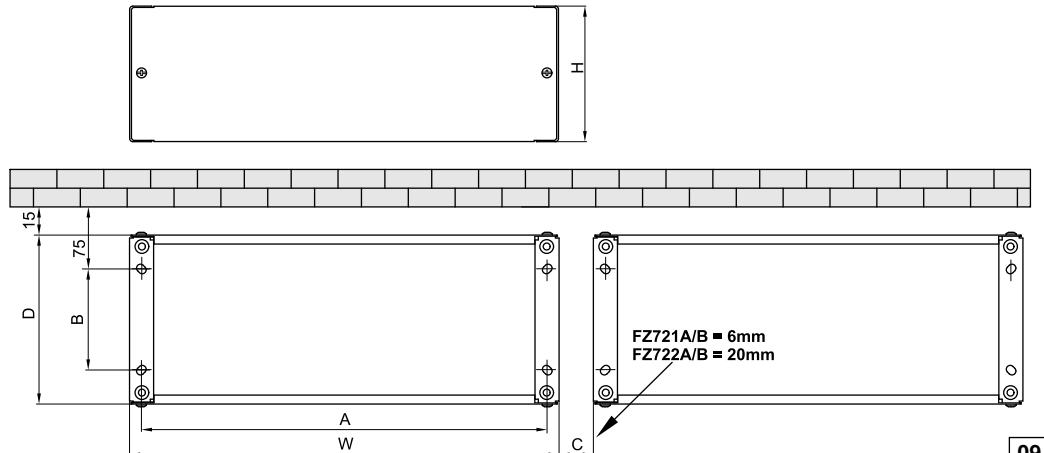


09

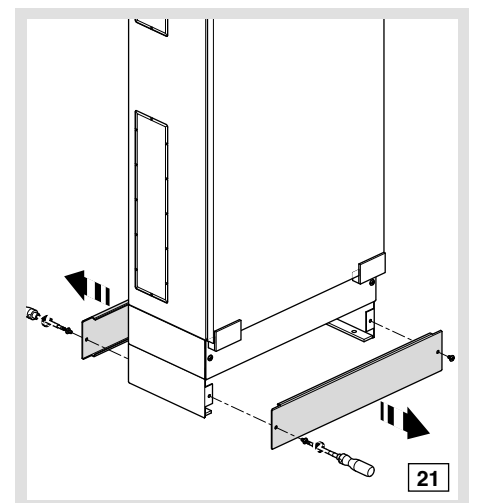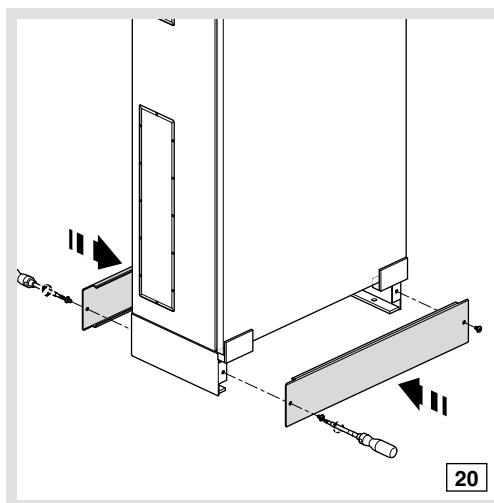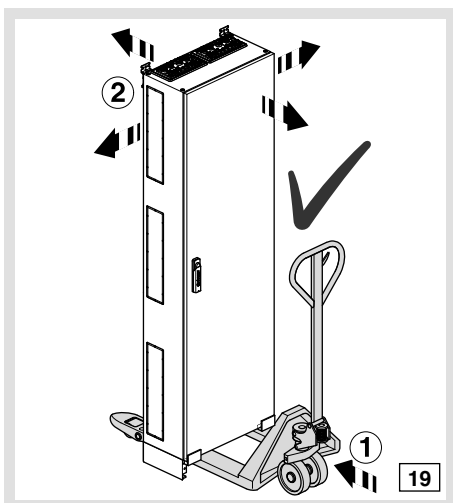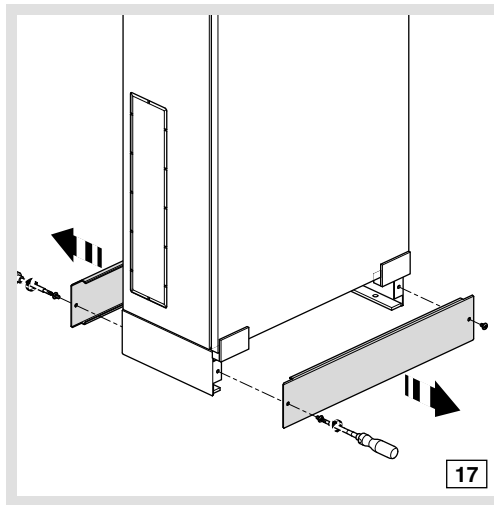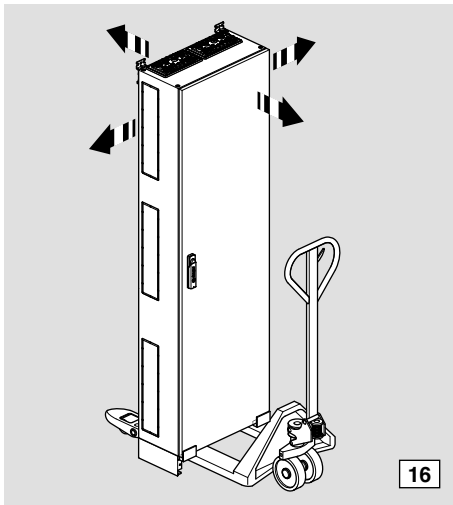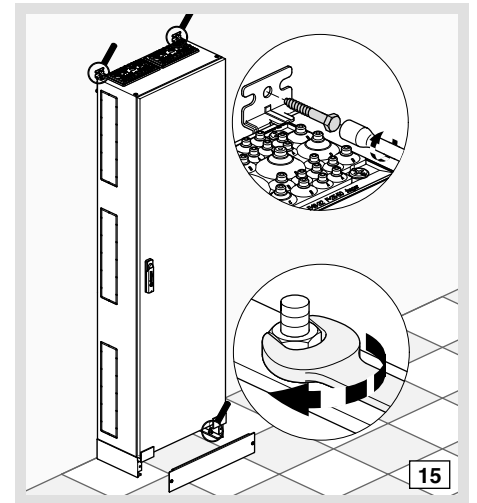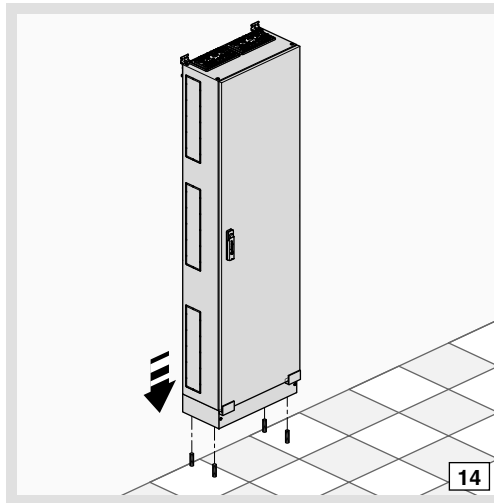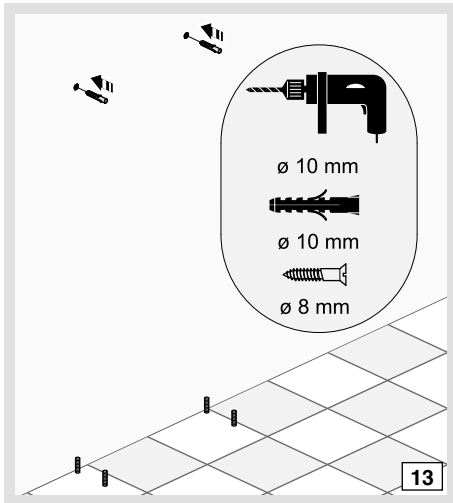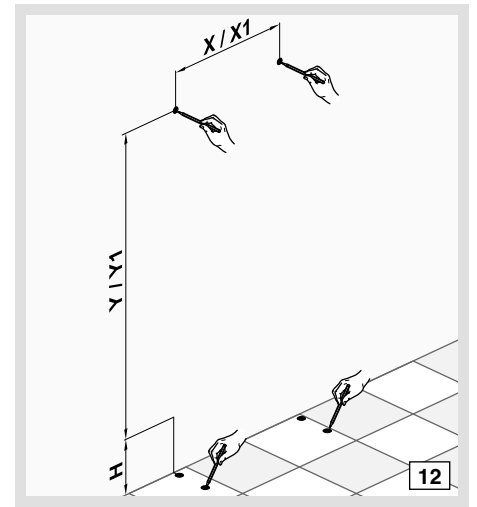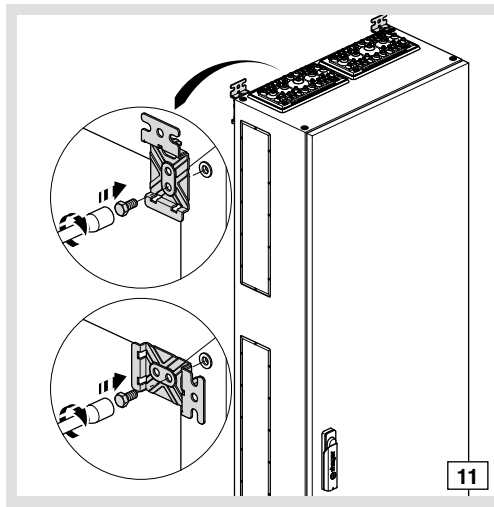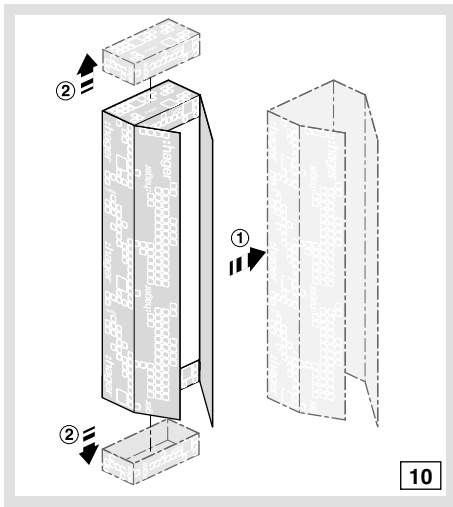

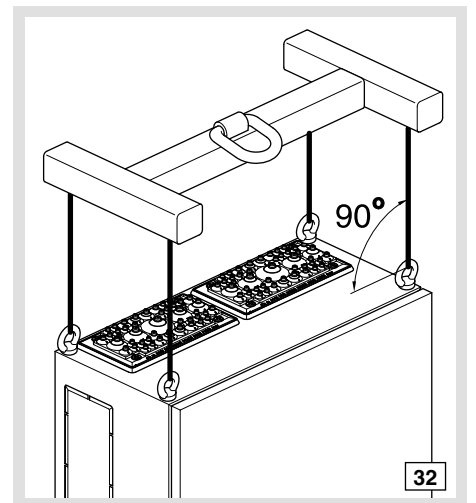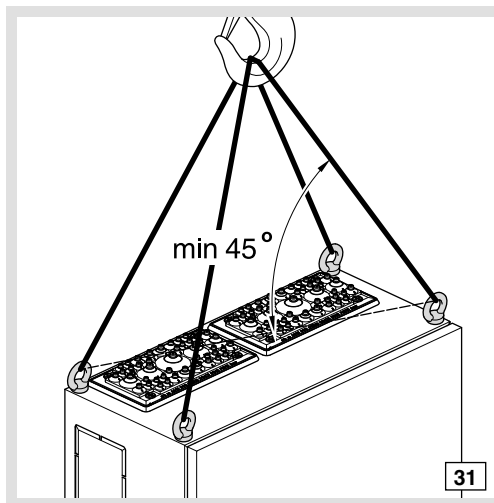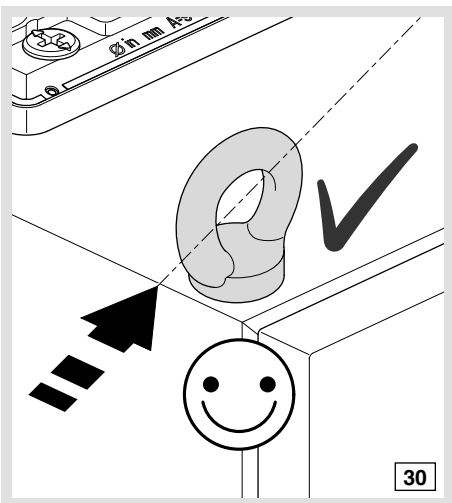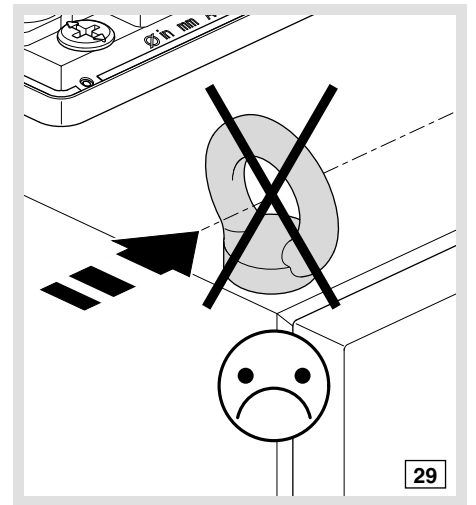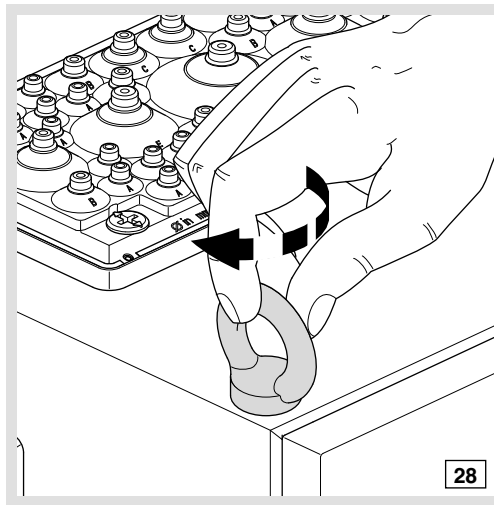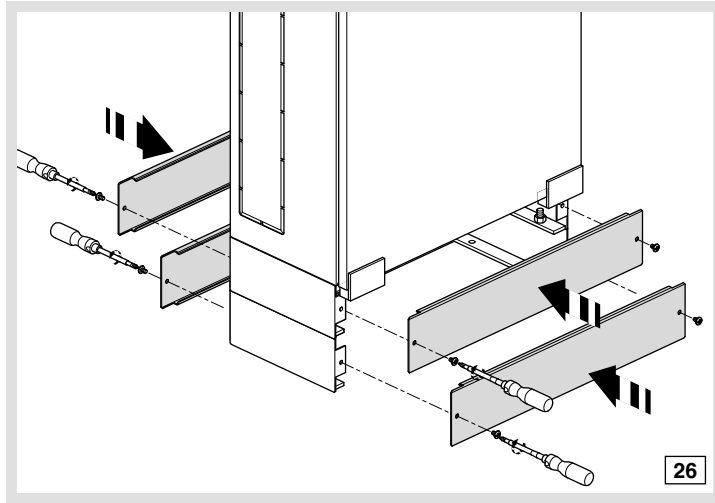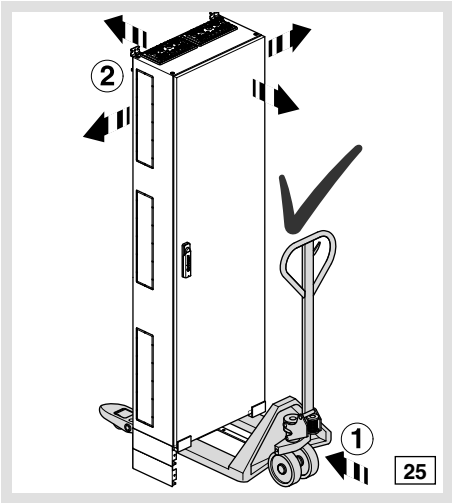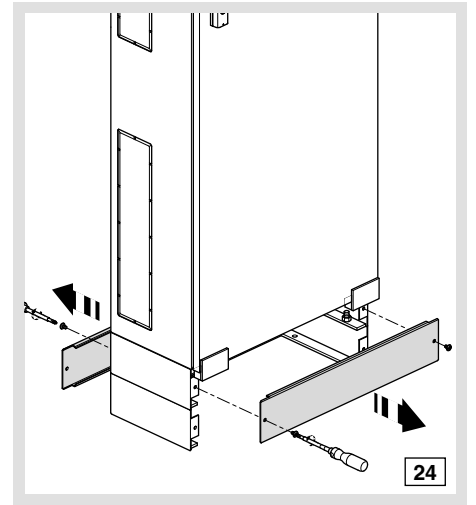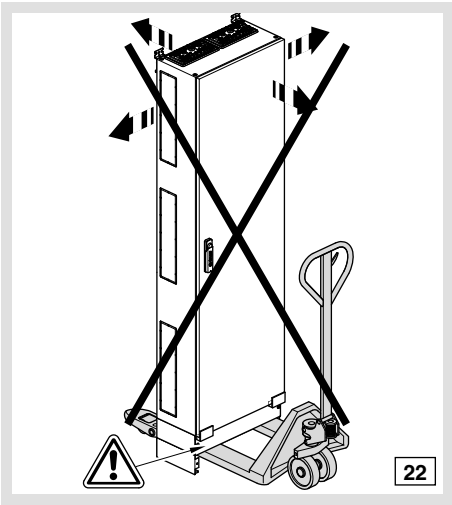


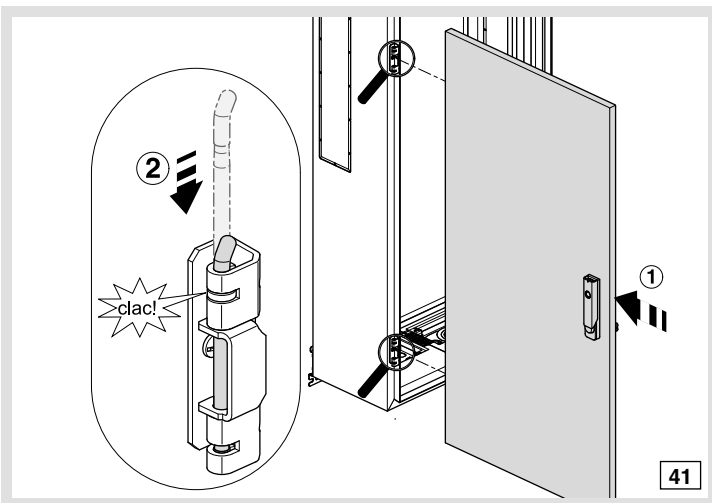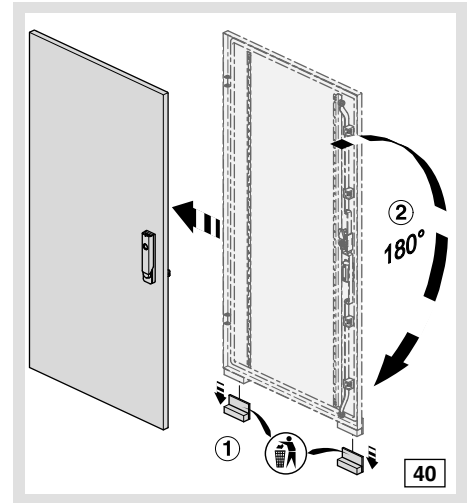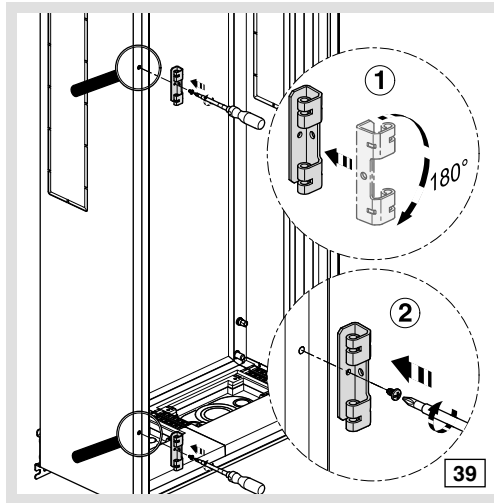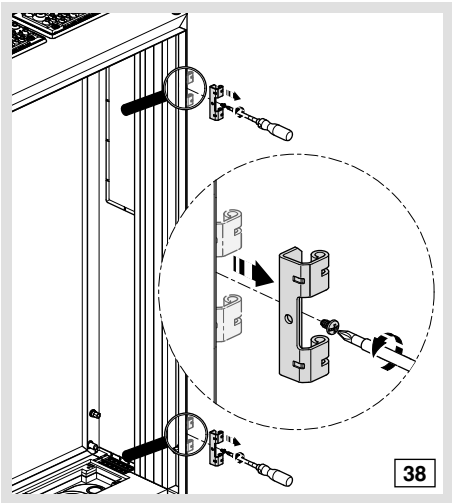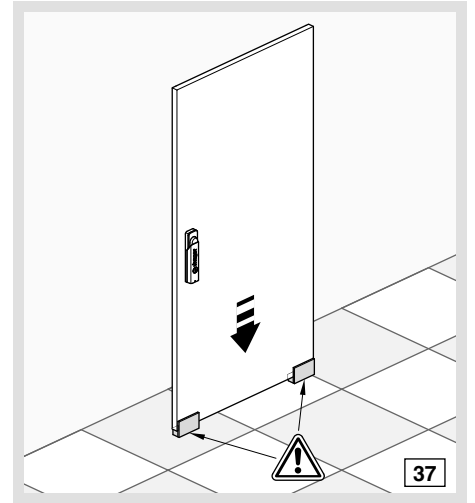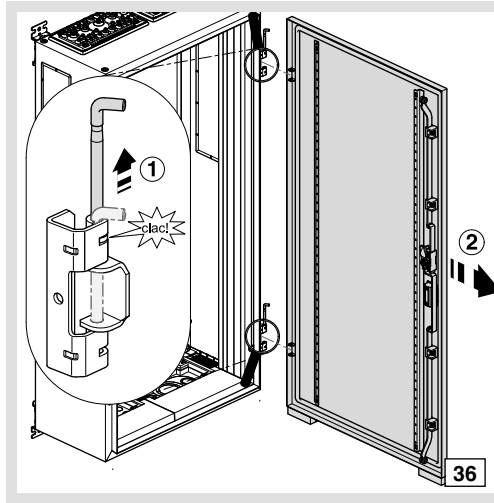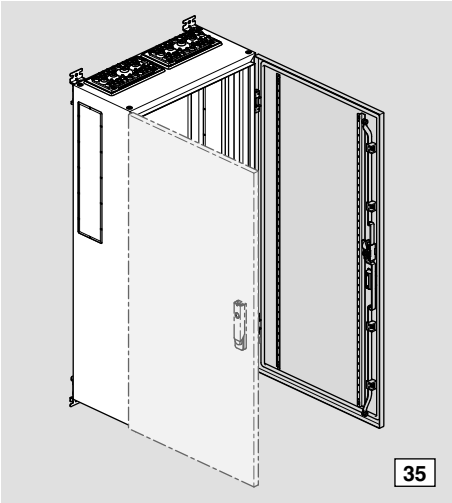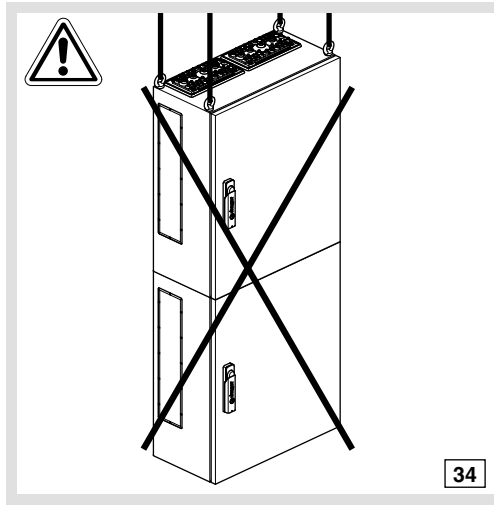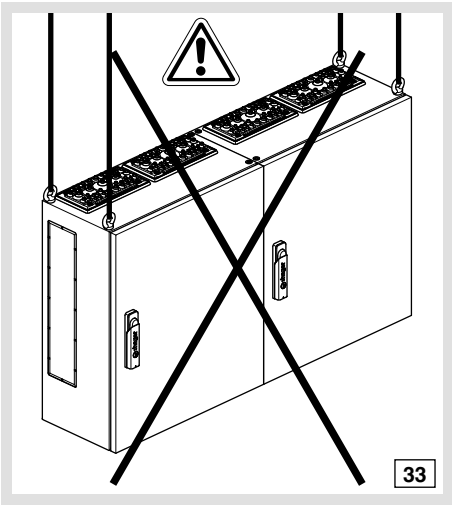


FZ800*
UT21*

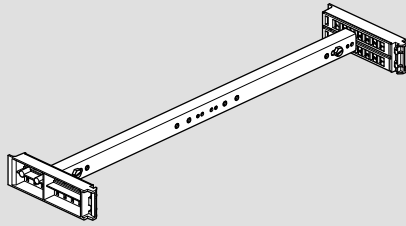


42

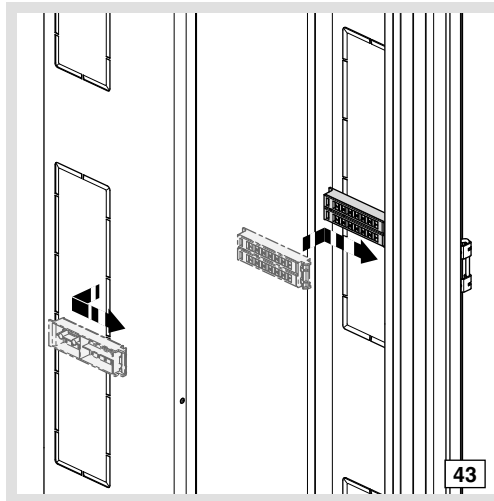


43

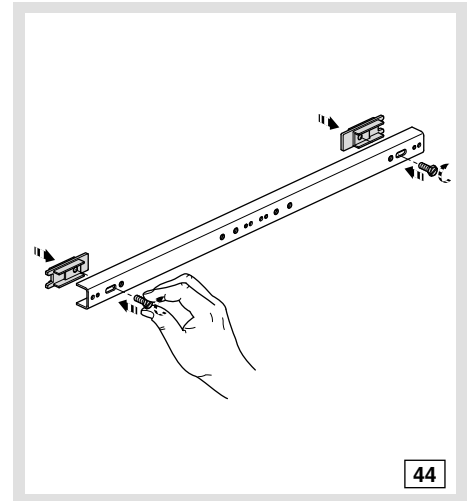

44

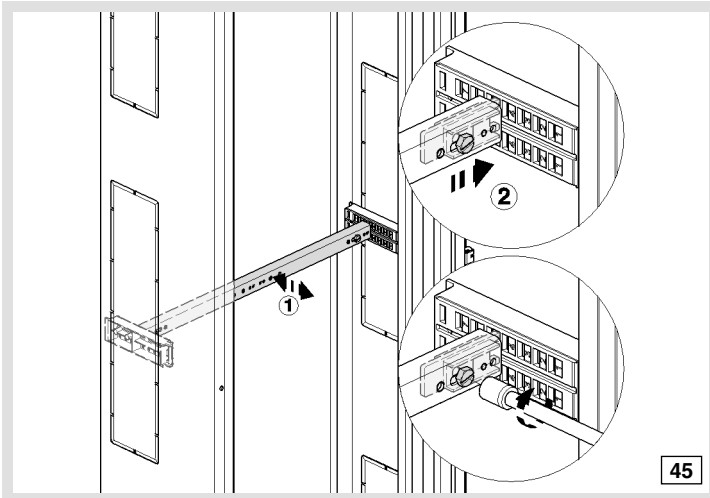


45

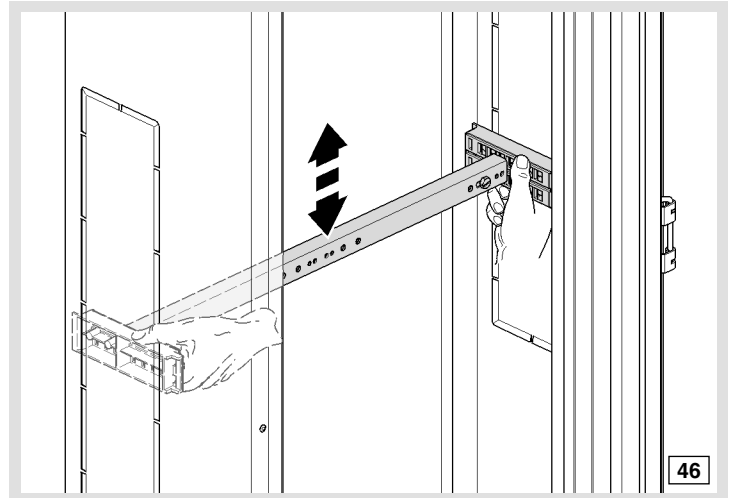


46


UT12PN
UT12QN

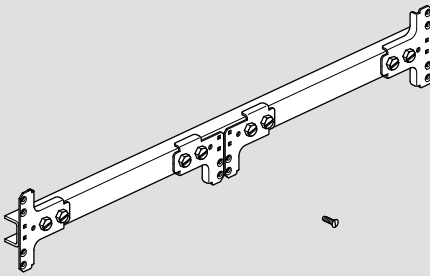


47

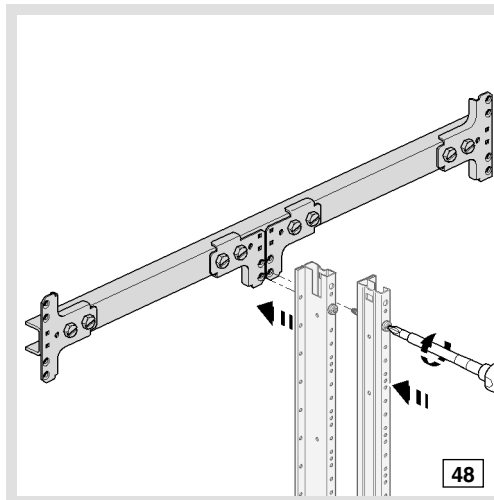

48

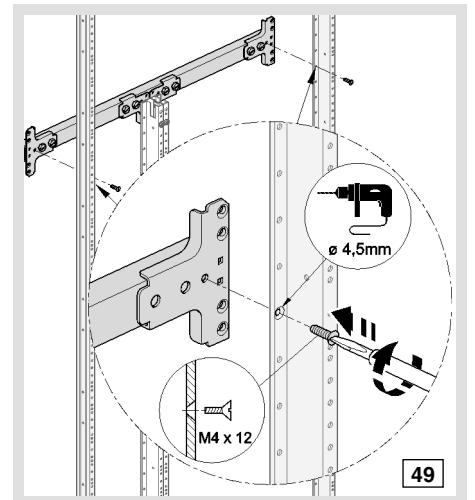


49

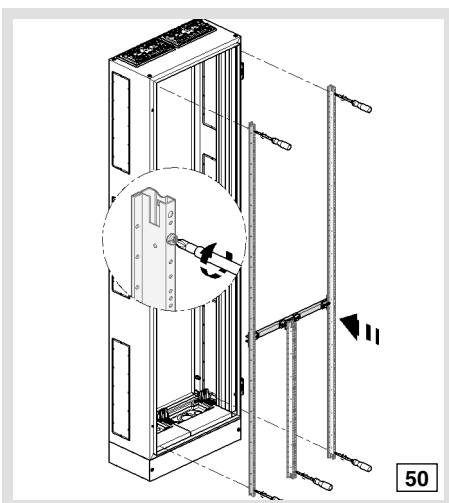


50


400 mm

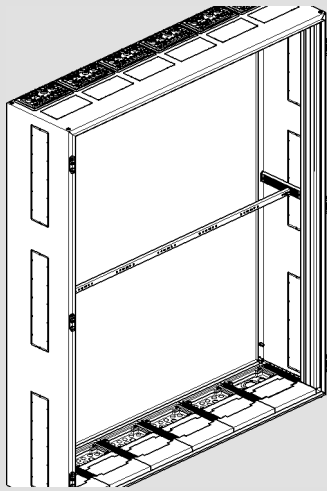


51

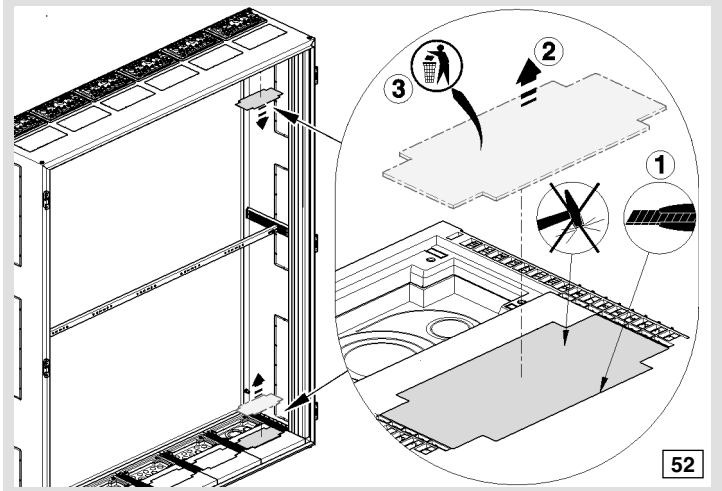

52

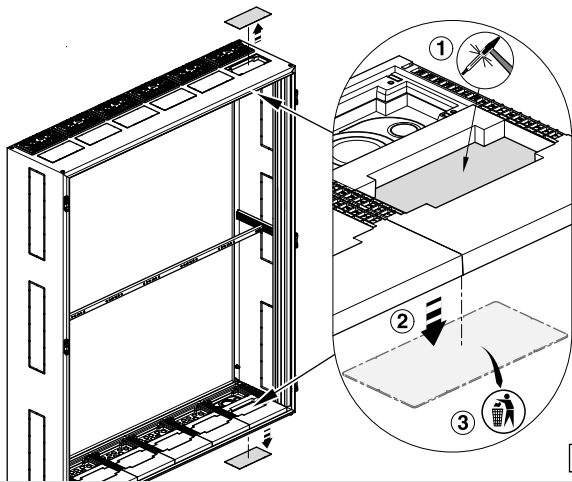


53

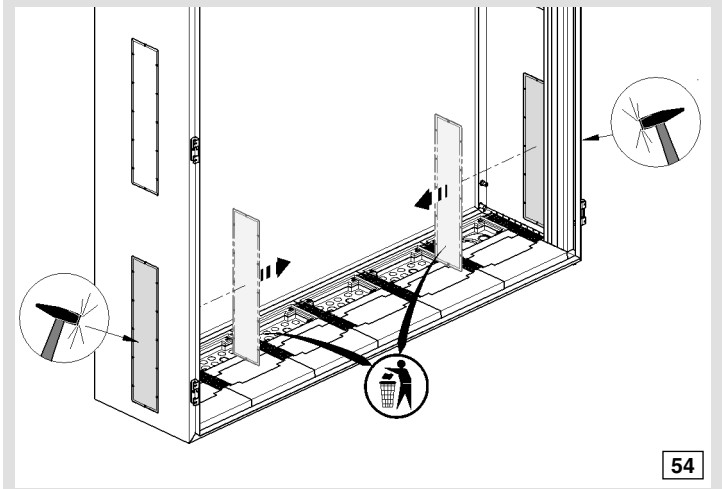


54


FZ721A/B>>FR* FV*
FZ722A/B>>FS*

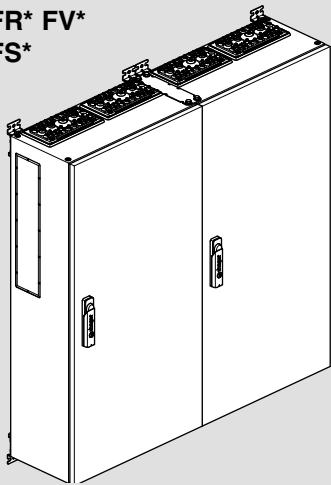


55

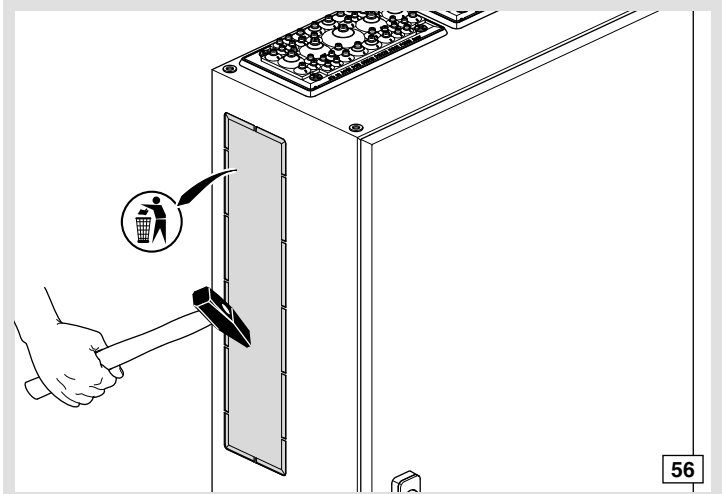








56

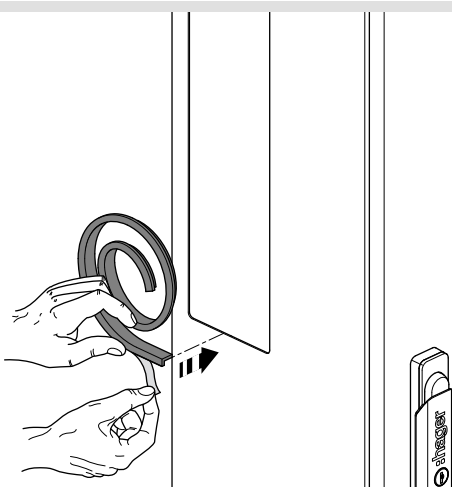


57

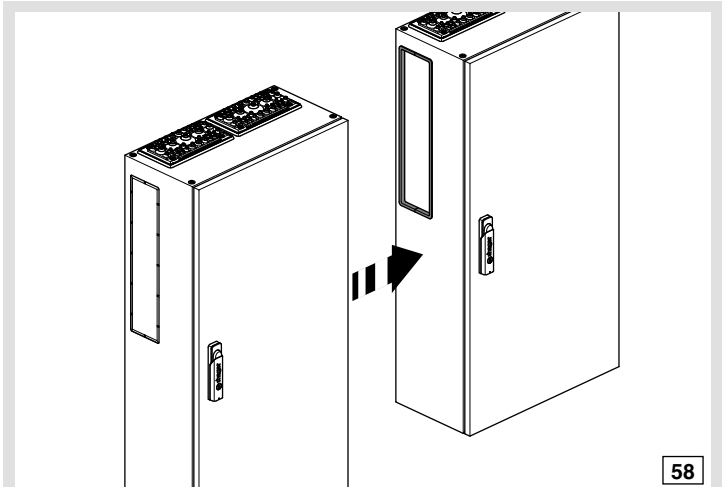


58

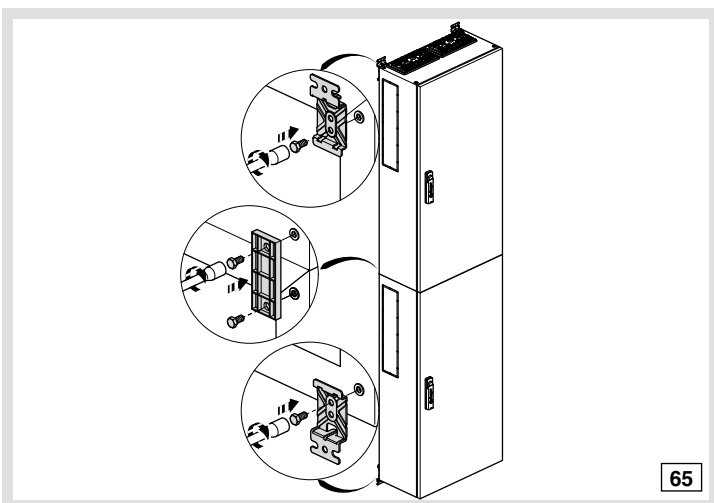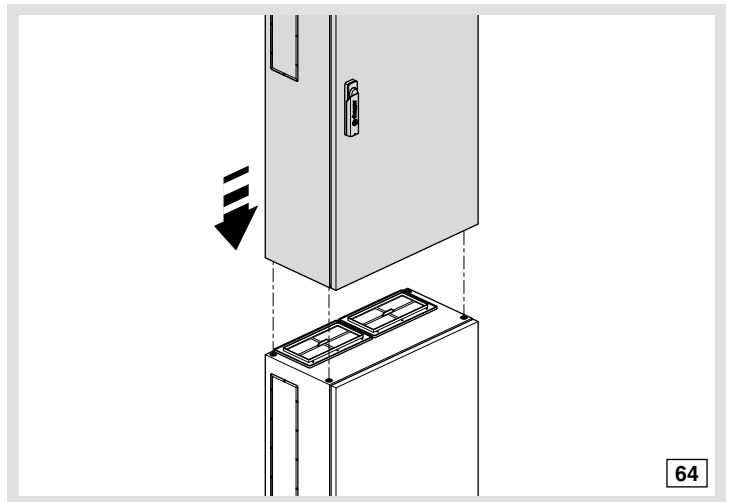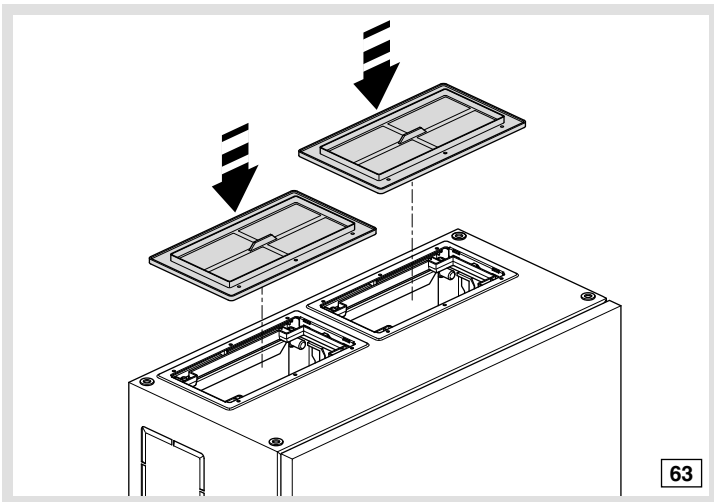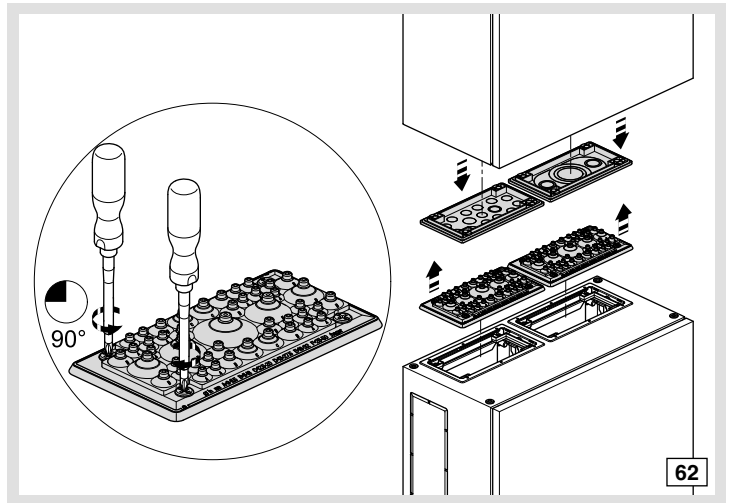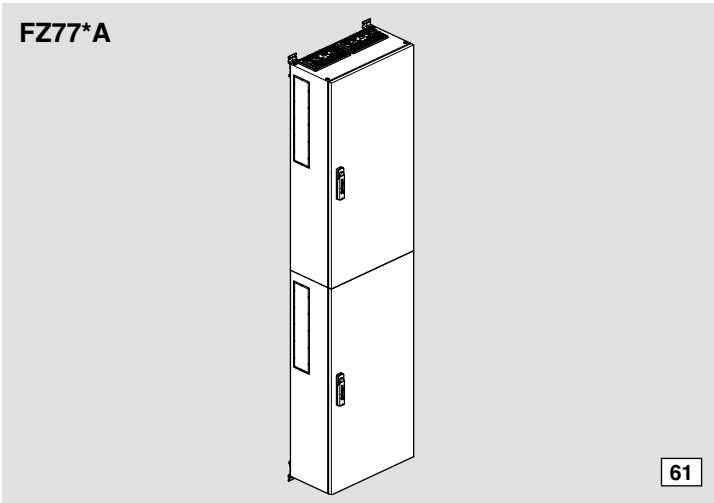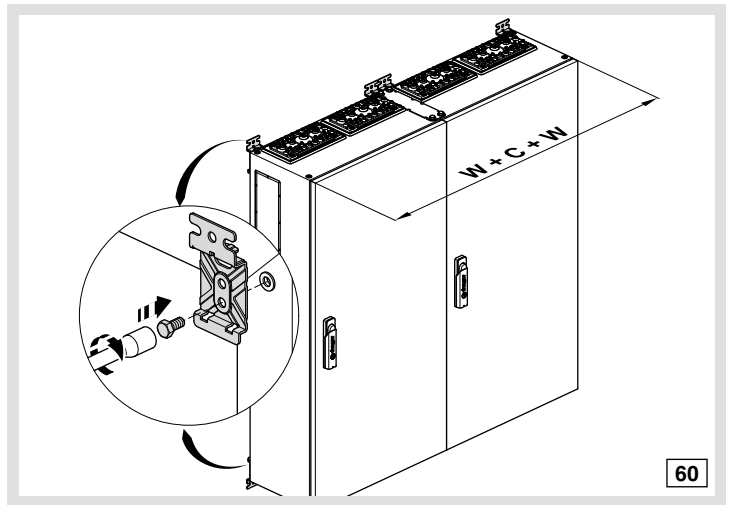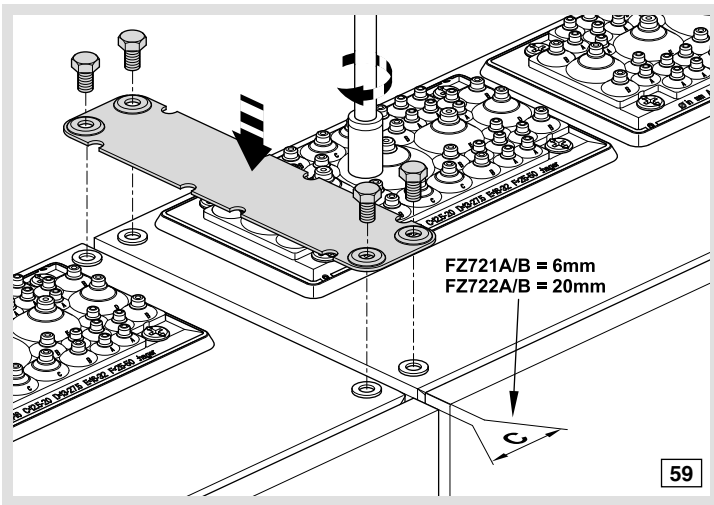


UT12L

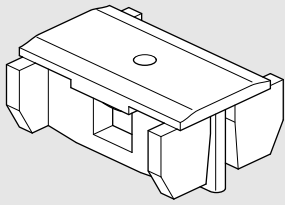

66

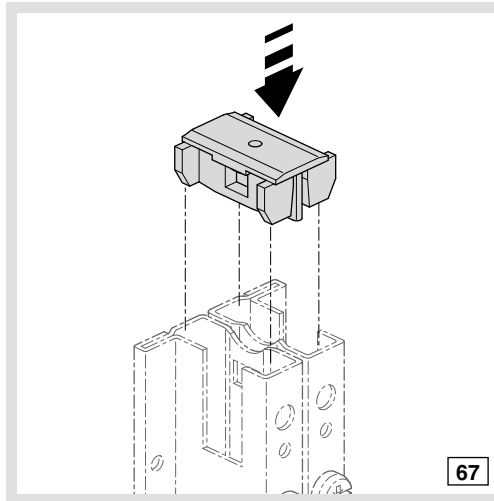


67

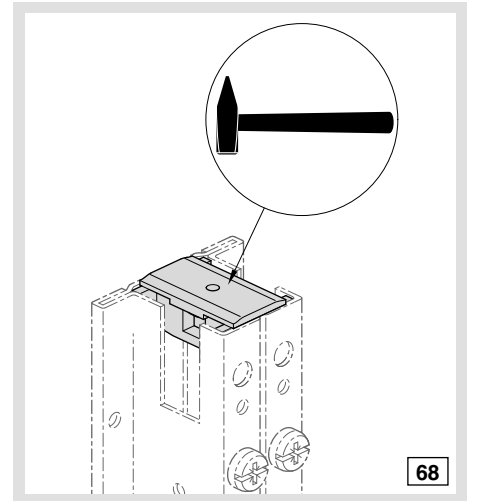


68


UT90G

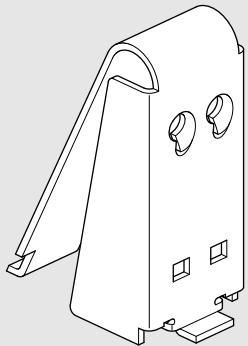

69

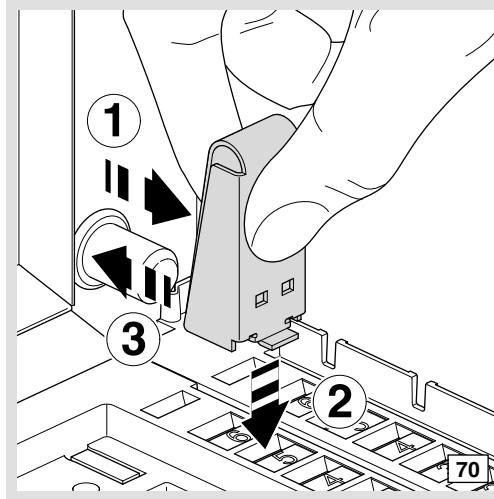


70

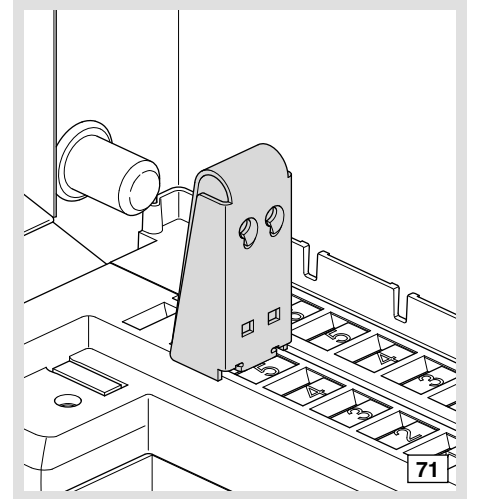


71


UT90J

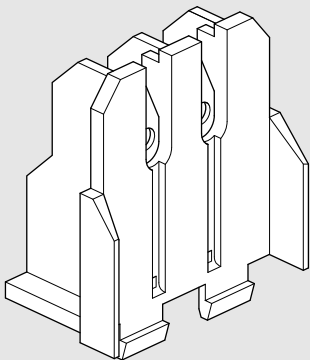

72

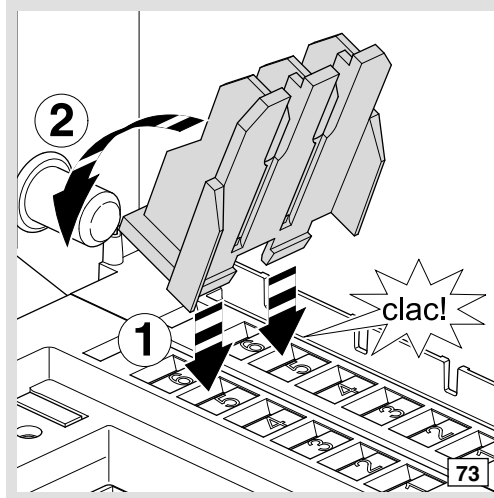


73

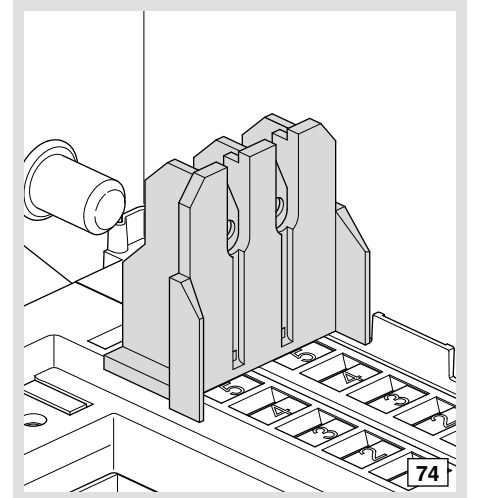


74

 
FZ537



75

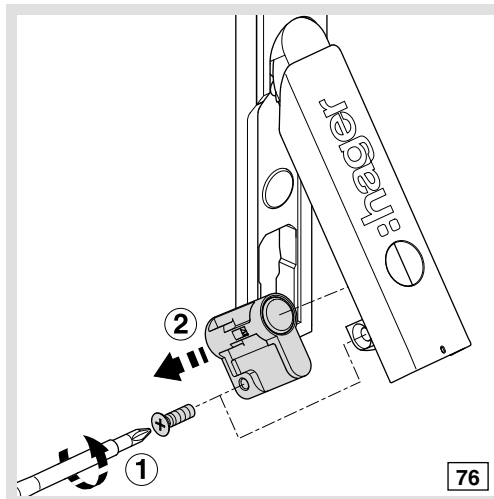

76

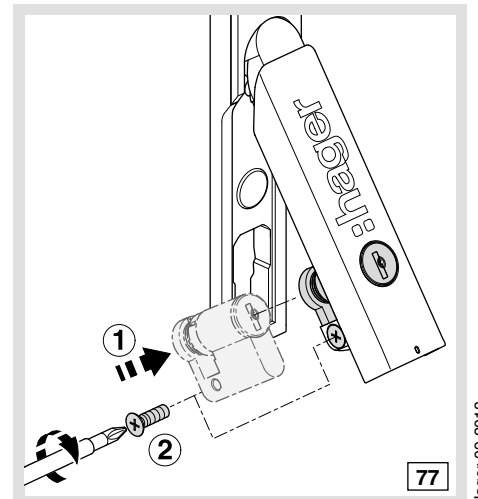

77