

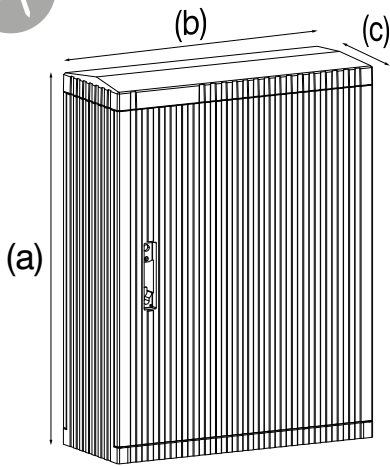
 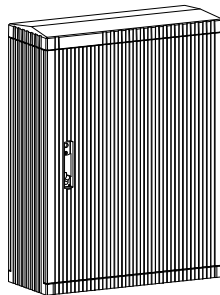
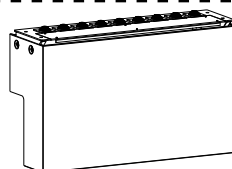

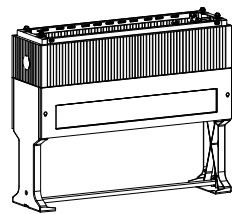



- | | | | |
|------|--------------------------|------|-------------------------|
| (DE) | Montageanleitung | (HR) | Upute za montažu |
| (FR) | Notice d'instructions | (HU) | Szerelési útmutató |
| (GB) | Mounting instructions | (LT) | Montavimo instrukcija |
| (NL) | Montage instructie | (LV) | Montāžas instrukcija |
| (DK) | Monteringsvejledning | (PL) | Instrukcja montażowa |
| (FI) | Asennusohje | (RO) | Instructiuni de montare |
| (NO) | Montasjeanvisning | (SK) | Návod na montáž |
| (SE) | Monteringsinstruktioner | (RU) | Указания по установке |
| (IT) | Istruzioni di montaggio | (BG) | Инструкции за монтаж |
| (ES) | Instrucciones de montaje | (GR) | Οδηγίες συναρμολόγησης |
| (PT) | Instruções de montagem | (SI) | Navodilo za montažo |
| (CZ) | Montážní návod | (EE) | Paigaldusjuhised |
| (BA) | Uputstvo za montažu | (IS) | Leiðbeiningar |
| (UK) | Інструкції з установки | (AR) | بيكرتال تامي لعت |

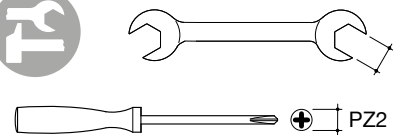



	a (mm)	b (mm)	c (mm)
00/845	845	480	315
0/845		585	
1/845		780	
2/845		1110	
0/1005	1005	585	
1/1005		780	
2/1005		1110	
0/1355	1355	585	
1/1355		780	
2/1355		1110	

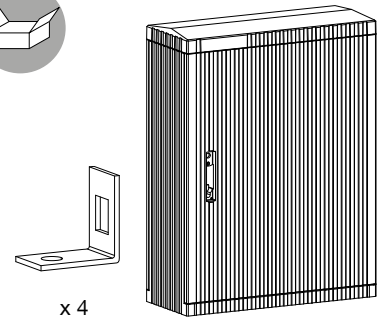

1


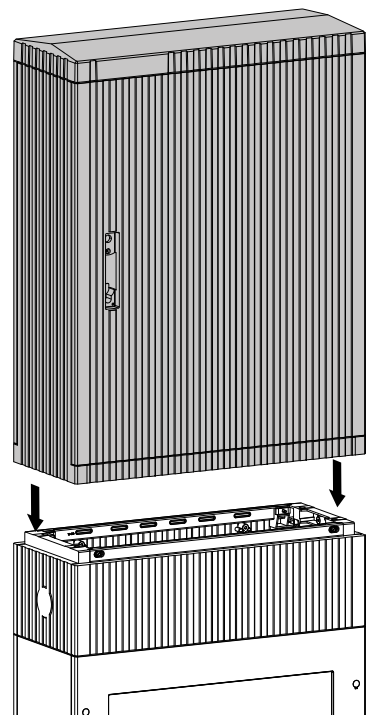


2

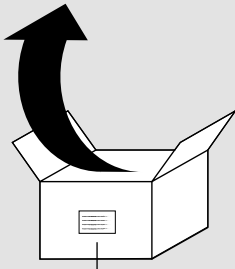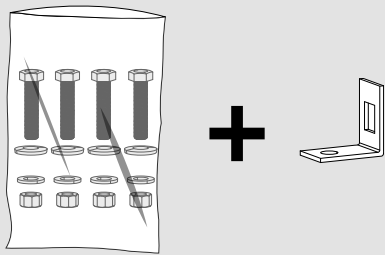


ZAX004 / ZAX005 / ZAX006
 ZAX007 / ZAX011 / ZAX012
 ZAX013 / ZAX014 / ZAX015
 ZAX016

40 Nm - 50 Nm max

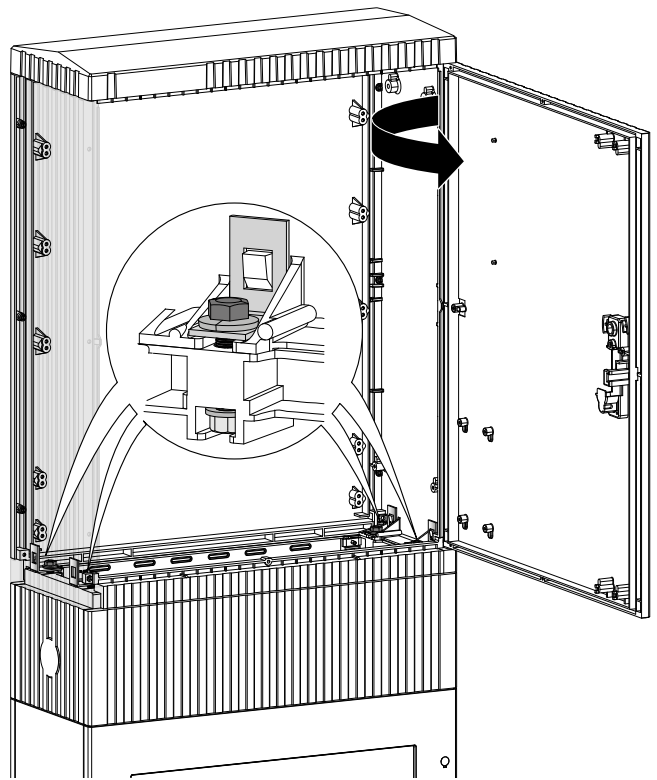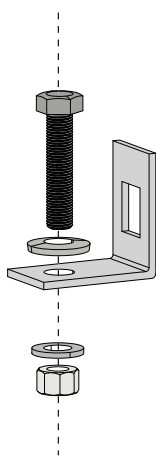


3

ZAX011 / ZAX012 / ZAX013

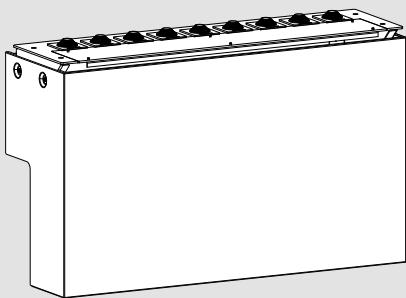

+

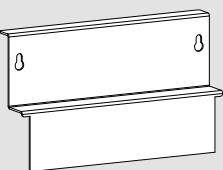

+

