








ZAX014 / ZAX015 / ZAX016

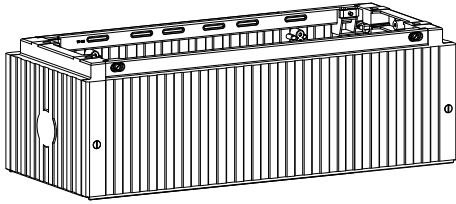


- | | | | |
|------|--------------------------|------|------------------------|
| Ⓧ DE | Montageanleitung | Ⓧ HR | Upute za montažu |
| Ⓧ FR | Notice d'instructions | Ⓧ HU | Szerelési útmutató |
| Ⓧ GB | Mounting instructions | Ⓧ LT | Montavimo instrukcija |
| Ⓧ NL | Montage instructie | Ⓧ LV | Montāžas instrukcija |
| Ⓧ DK | Monteringsvejledning | Ⓧ PL | Instrukcja montażowa |
| Ⓧ FI | Asennusohje | Ⓧ RO | Intruțiuni de montare |
| Ⓧ NO | Montasjeanvisning | Ⓧ SK | Návod na montáž |
| Ⓧ SE | Monterings instruktioner | Ⓧ RU | Указания по установке |
| Ⓧ IT | Istruzioni di montaggio | Ⓧ BG | Инструкции за монтаж |
| Ⓧ ES | Instrucciones de montaje | Ⓧ GR | Οδηγίες συναρμολόγησης |
| Ⓧ PT | Instruções de montagem | Ⓧ SI | Navodilo za montažo |
| Ⓧ CZ | Montážní návod | Ⓧ EE | Paigaldusjuhised |
| Ⓧ BA | Uputstvo za montažu | Ⓧ IS | Leiðbeiningar |
| Ⓧ UK | Інструкції з установки | Ⓧ AR | بيكترتال تامي لعن |

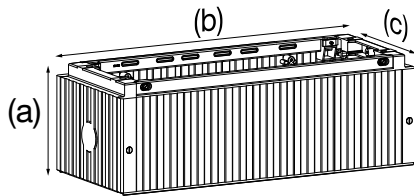


	a (mm)	b (mm)	c (mm)
ZAX014	250	585	315
ZAX015	250	780	315
ZAX016	250	1110	315

  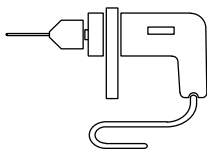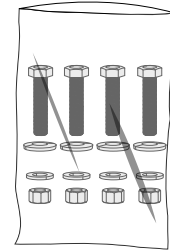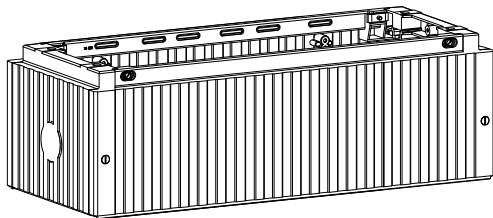

1

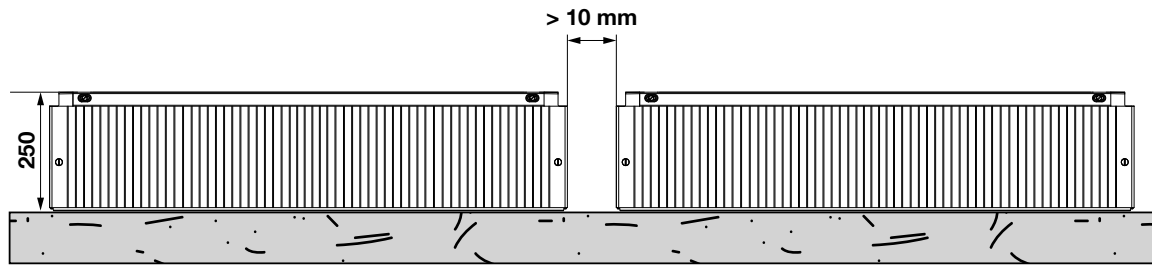







2

 


ZAX014

ZAX015


ZAX016

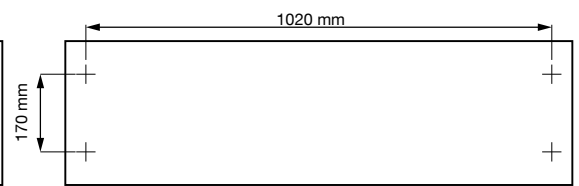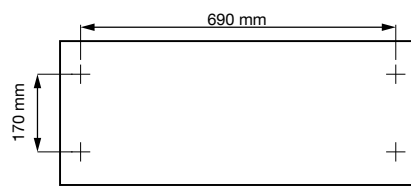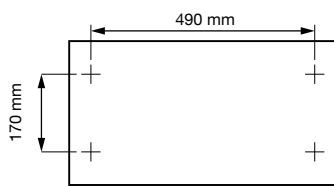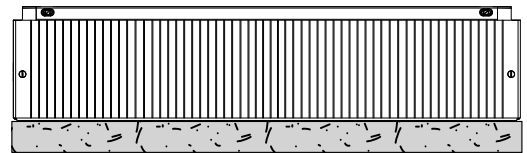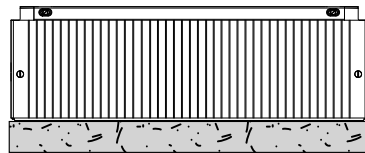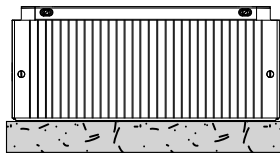

3

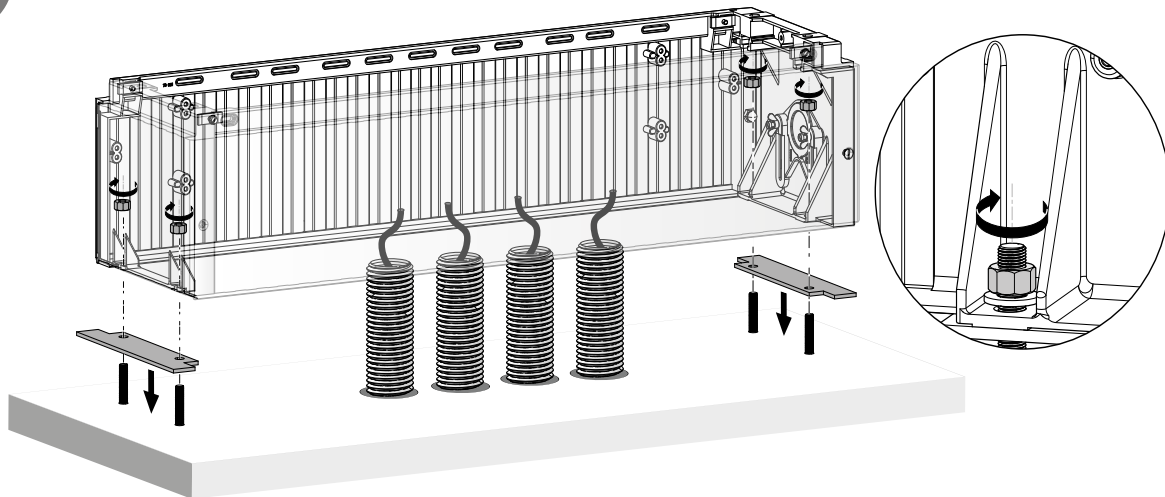

4

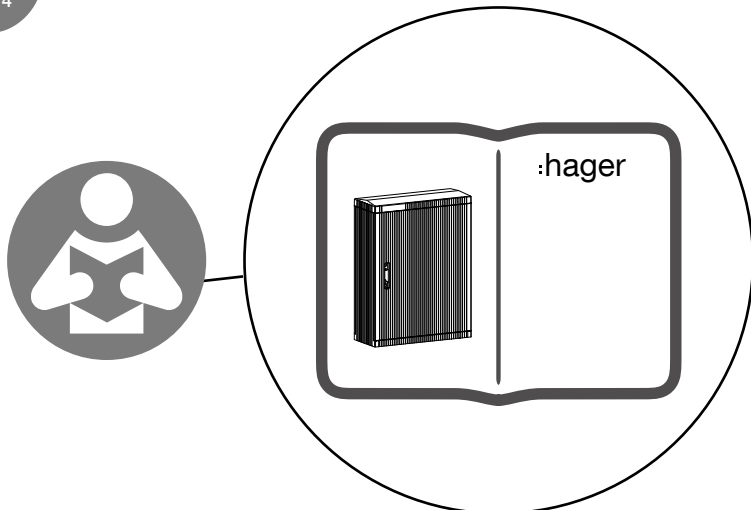

5

