





ZAX011 / ZAX012 / ZAX013

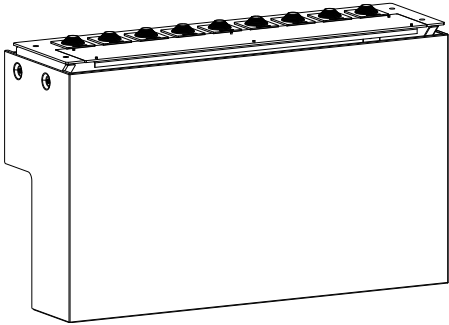

- | | | | |
|------|--------------------------|------|------------------------|
| Ⓧ DE | Montageanleitung | Ⓧ HR | Upute za montažu |
| Ⓧ FR | Notice d'instructions | Ⓧ HU | Szerelési útmutató |
| Ⓧ GB | Mounting instructions | Ⓧ LT | Montavimo instrukcija |
| Ⓧ NL | Montage instructie | Ⓧ LV | Montāžas instrukcija |
| Ⓧ DK | Monteringsvejledning | Ⓧ PL | Instrukcja montażowa |
| Ⓧ FI | Asennusohje | Ⓧ RO | Intruțiuni de montare |
| Ⓧ NO | Montasjeanvisning | Ⓧ SK | Návod na montáž |
| Ⓧ SE | Monterings instruktioner | Ⓧ RU | Указания по установке |
| Ⓧ IT | Istruzioni di montaggio | Ⓧ BG | Инструкции за монтаж |
| Ⓧ ES | Instrucciones de montaje | Ⓧ GR | Οδηγίες συναρμολόγησης |
| Ⓧ PT | Instruções de montagem | Ⓧ SI | Navodilo za montažo |
| Ⓧ CZ | Montážní návod | Ⓧ EE | Paigaldusjuhised |
| Ⓧ BA | Uputstvo za montažu | Ⓧ IS | Leiðbeiningar |
| Ⓧ UK | Інструкції з установки | Ⓧ AR | بيكترتال تامي لعت |

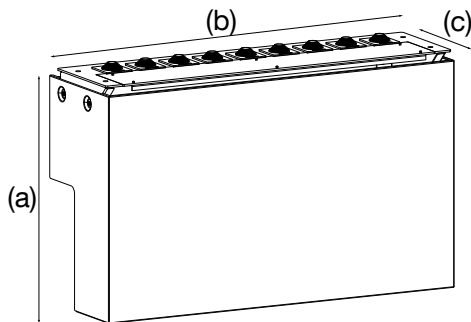

	a (mm)	b (mm)	c (mm)
ZAX011	638	551	350
ZAX012	638	746	350
ZAX013	638	1066	350

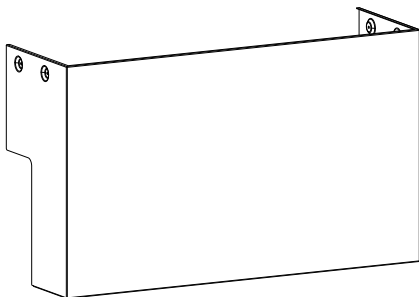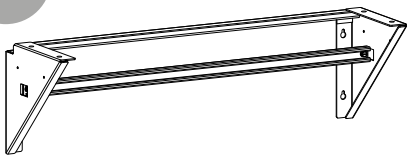






x 4





x 2



    x 4

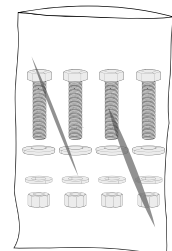

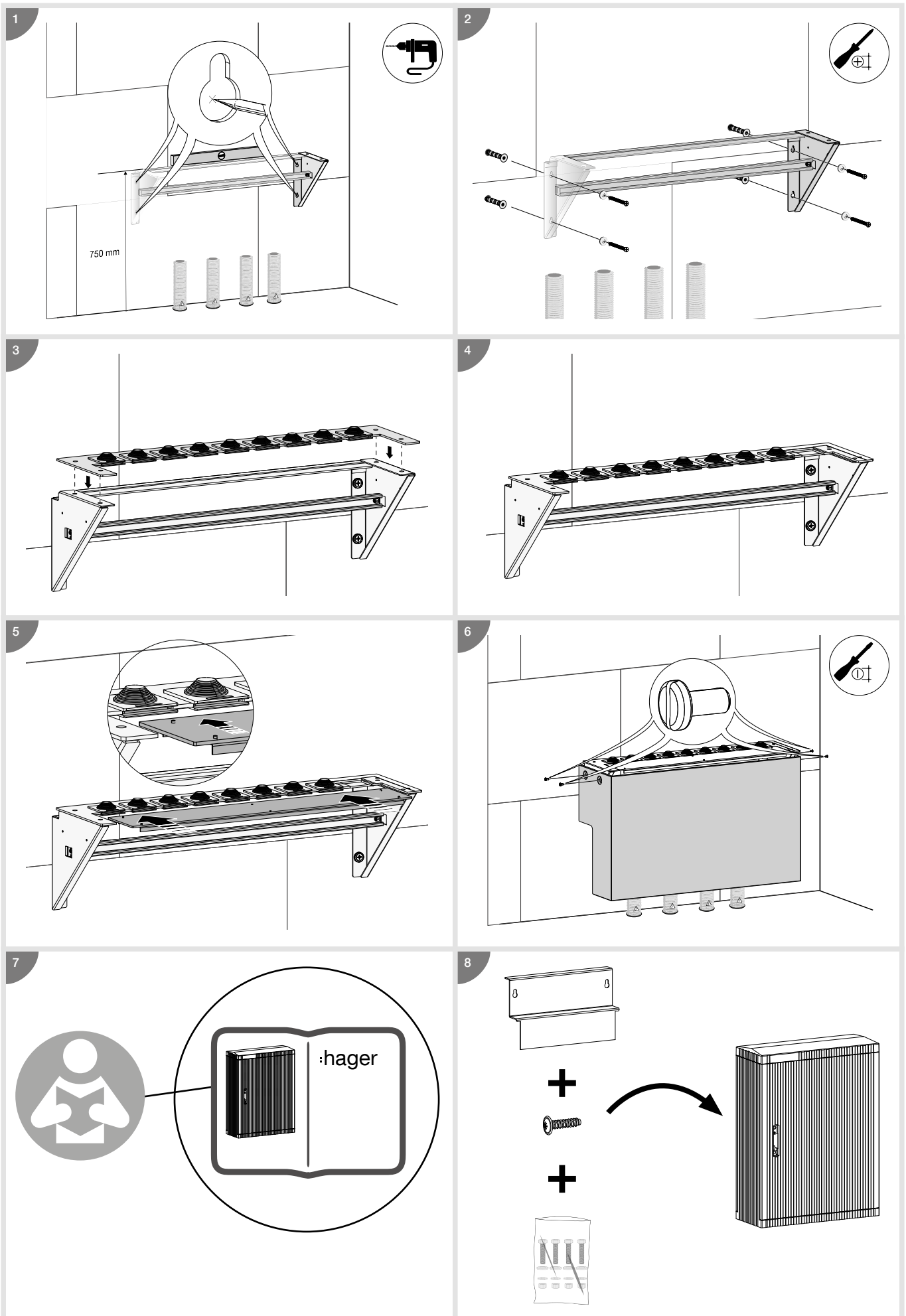

 Non-binding document, subject to modification without notice.