


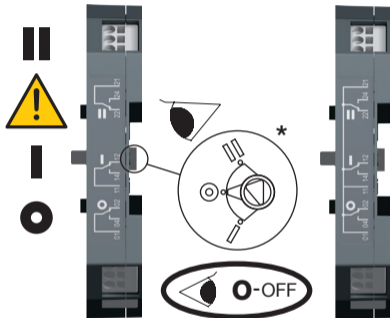

548355A



PUSH IN

solid



0.2 to 4 mm²
20 to # 12 AWG

stranded



0.2 to 2.5 mm²
20 to # 14 AWG

10 mm / 0.39 "

loose strands




0.2 to 2.5 mm²
20 to # 14 AWG




10 mm / 0.39 "

slotted head 2.5 mm / 0.1 "

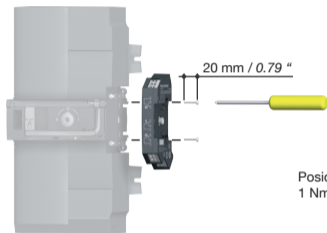

Posidriv PZ2
1 Nm / 8.8 lb-in

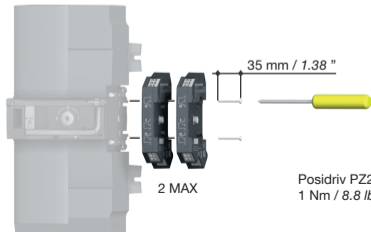

2 MAX

Posidriv PZ2
1 Nm / 8.8 lb-in