






 



- FR Interrupteurs sectionneurs à coupure visible
- EN Onload disconnect switch with visible breaking
- DE Lasttrennschalter mit sichtbarer Trennung
- IT Sezionatori a comando rotativo apertura apparente
- ES Inter corte visible

250 - 400 A


Ith	(A)	250	400
Ui	(V)	800	800
U imp	(kV)	8	8
AC (240V)		AC22A	AC22A
Icc max	(A)	11 900	15 300
I cw	(A)	7000	9000
I ccF	(kA)	80	50
 gl - gG		250 A	400 A
 Ø M	(mm)	M 8	M 10
	(mm)	16	40
	(mm)	16	40

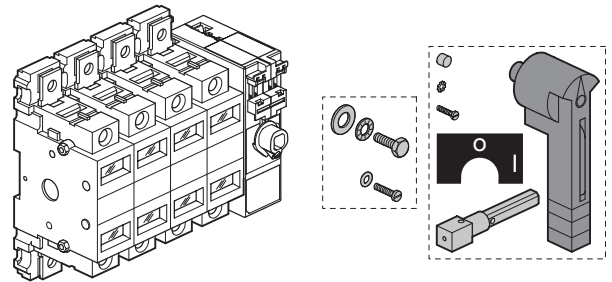


	250 A	400 A
	8	
	PZ 2	
	8 - 2,5	2,5
	13	10 - 17





250 A

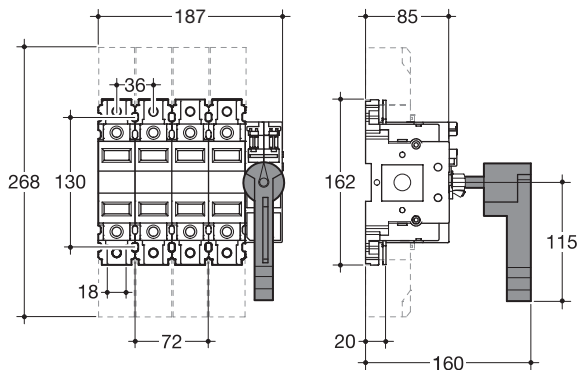


400 A

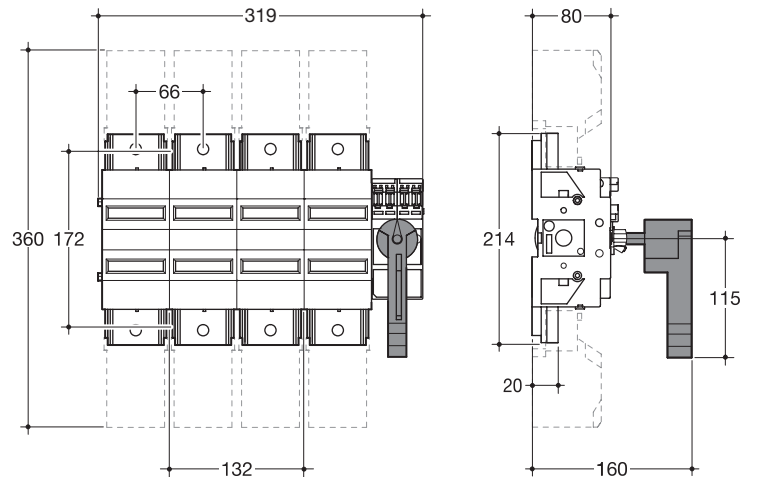


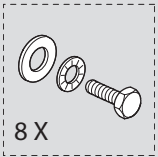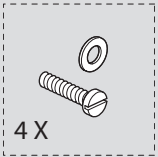

250 A

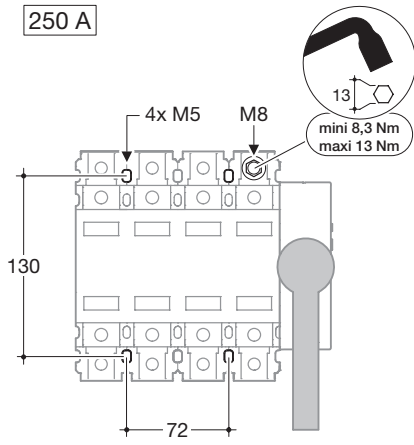


400 A

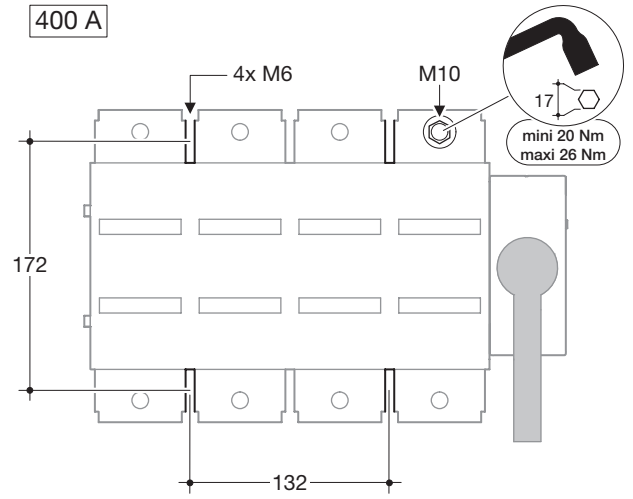


1


250 A
400 A

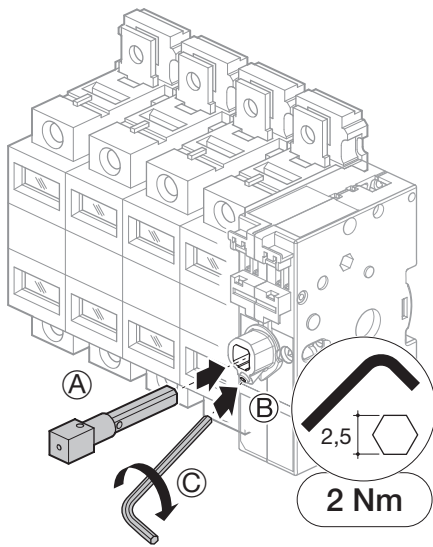


2

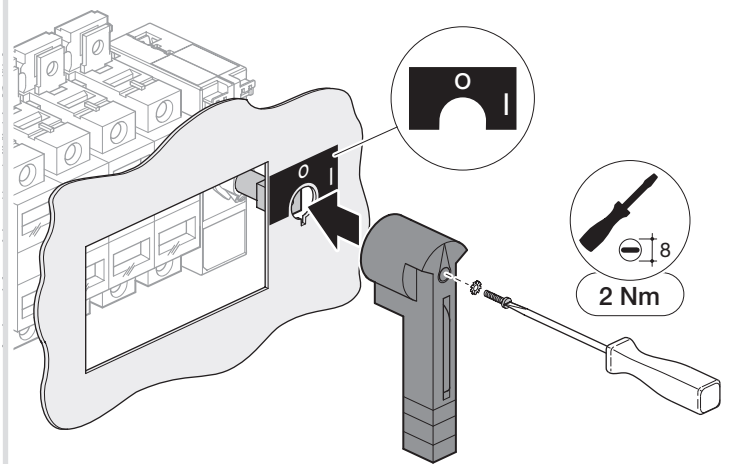


3

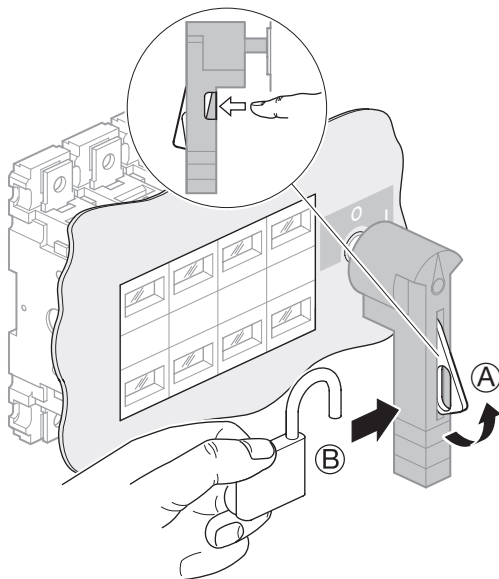

4


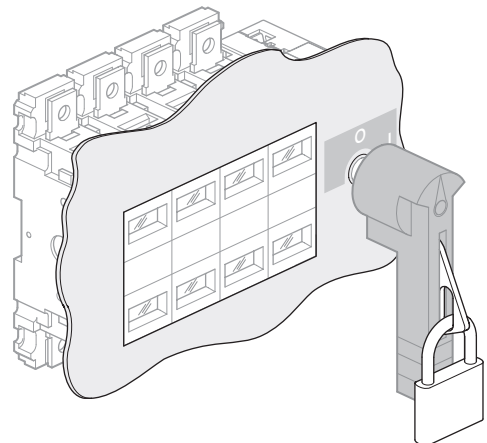


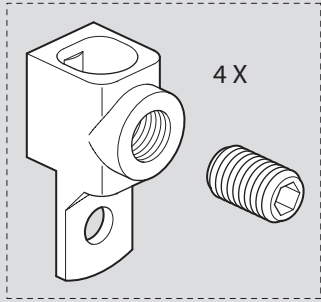



4 X

HZ093 (250A)

	(mm ²)	16...185
	(mm ²)	16...185
	(mm)	30

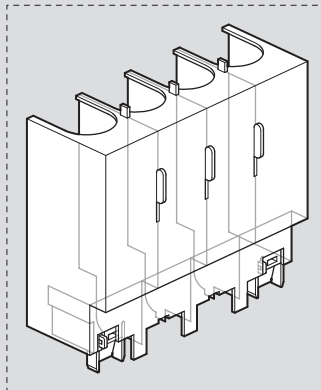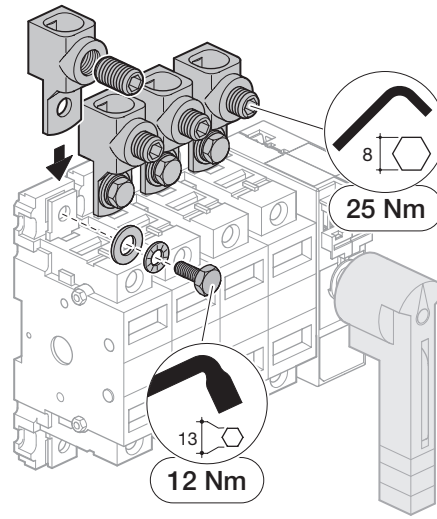

HZ094 (250A)

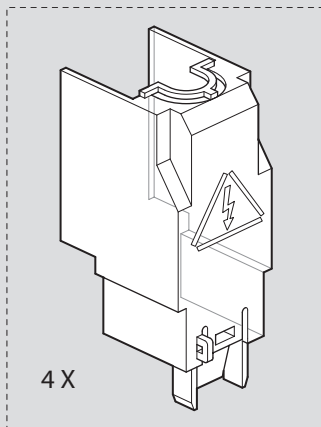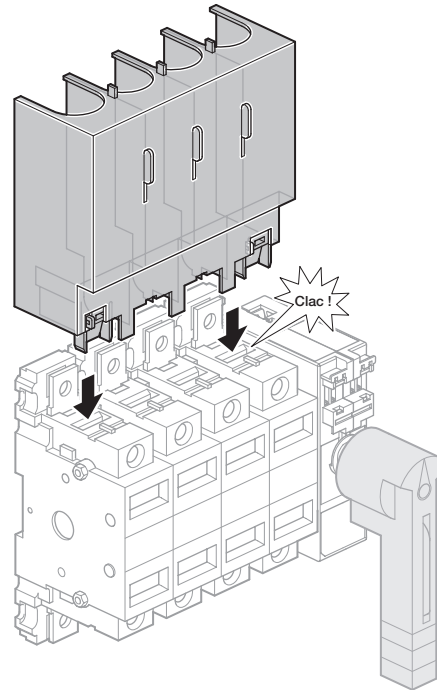

4 X

HZ095 (250A)
HZ096 (400A)

