

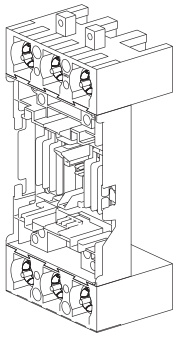
 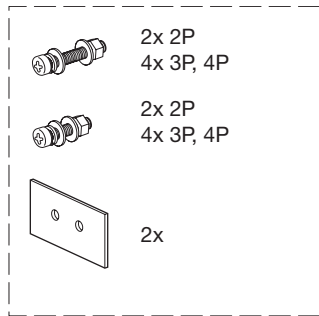


6H5062.b



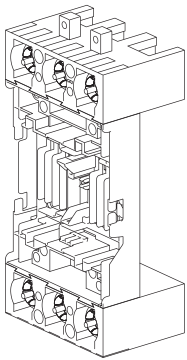


(FR) Base Plug-in
(EN) Plug in base


h250, h630, h1000



HYC200H	Plug-in base h250 LSI 3P
HYC201H	Plug-in base h250 LSI 4P
HYD200H	Plug-in base h630 LSI 3P (400A)
HYD201H	Plug-in base h630 LSI 4P (400A)
HYE200H	Plug-in base h1000 LSI 3P (630A)
HYE201H	Plug-in base h1000 LSI 4P (630A)

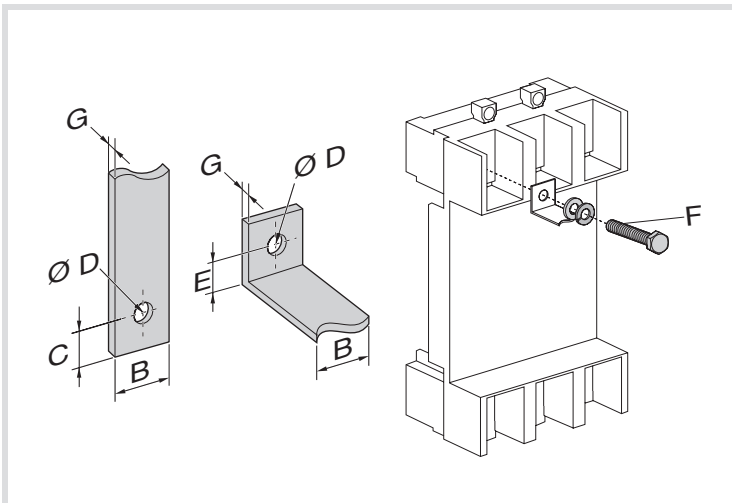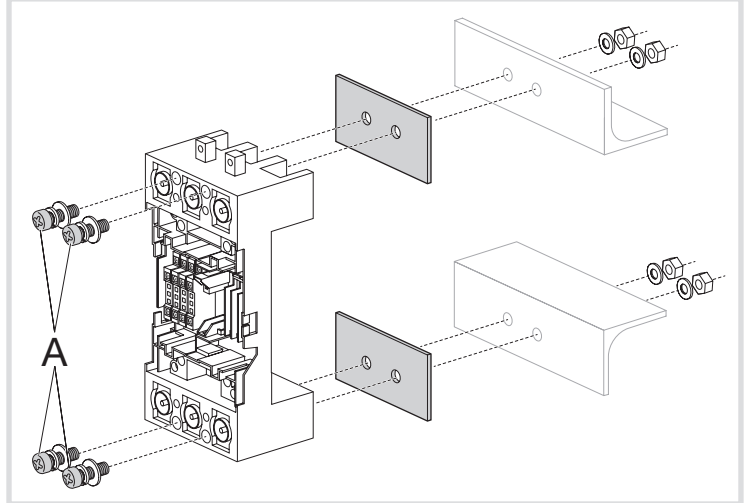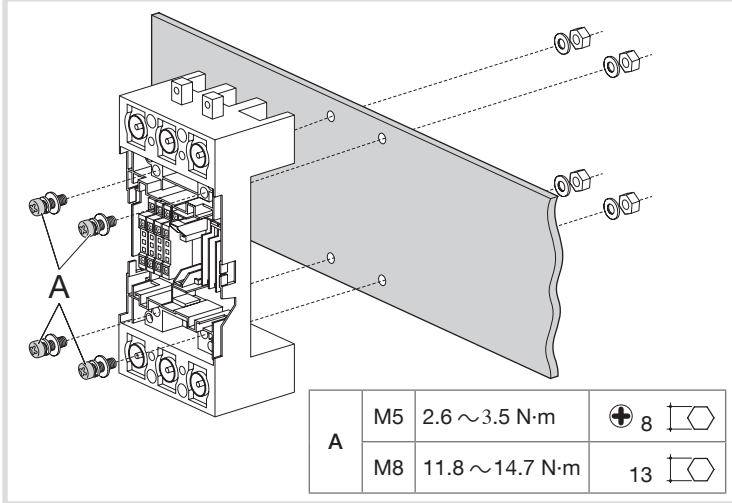


	h250	h630 (400A)	h1000 (630A)
B	≤ 22 mm	≤ 30 mm	≤ 40 mm
C	≤ 15,5 mm	≤ 20 mm	≤ 26,5 mm
D	9 mm	11 mm	13 mm
E	≤ 15,5 mm	≤ 20 mm	—
F	M8 x 18 max 13	M10 x 30 max 17	M12 x 25 max 19
	8,8 ~ 14,7 Nm	18,6 ~ 29,4 Nm	32,3 ~ 51,9 Nm
G	6 mm max	8 mm max	10 mm max

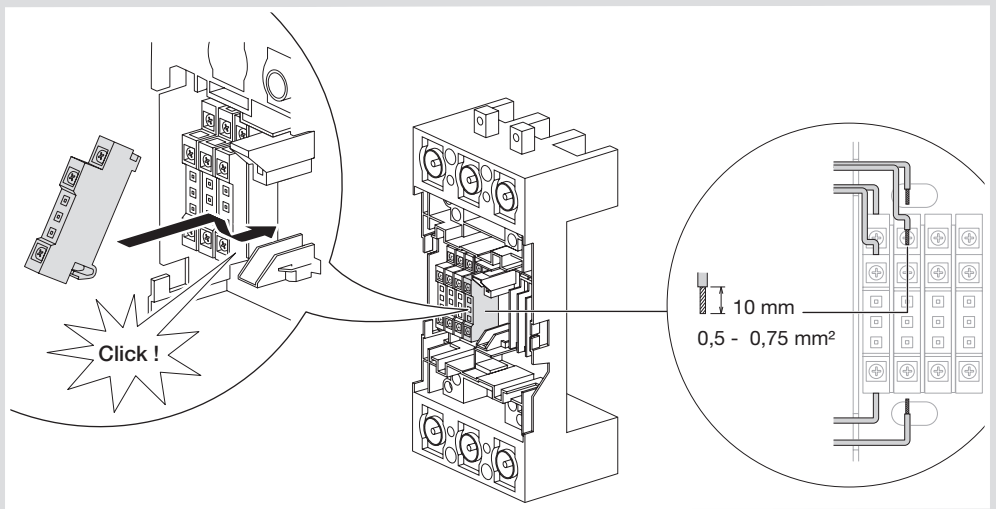


h250 3P, 4P				h630 3P, 4P h1000 3P, 4P					
AXa1	AXa2	ALa1	C1	AXa1	AXa2	AXa3	ALa1		C1
AXb1	AXb2	ALb1		AXb1	AXb2	AXb3	ALb1		
AXc1	AXc2	ALc1	C2	AXc1	AXc2	AXc3	ALc1		C2
AXa1	AXa2	ALa1	D1	AXa1	AXa2	AXa3	ALa1		D1
AXb1	AXb2	ALb1		AXb1	AXb2	AXb3	ALb1		
AXc1	AXc2	ALc1	D2	AXc1	AXc2	AXc3	ALc1		D2

En option
Optional

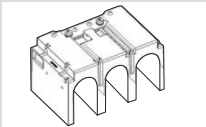

- Capot cache-bornes
- Terminal covers

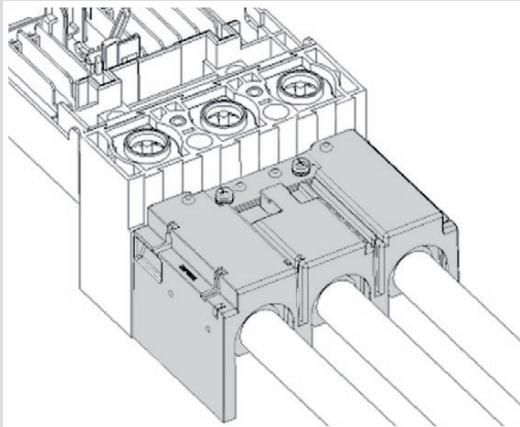

HYC321H	Terminal cover plug-in base h250 LSI 3P
HYC322H	Terminal cover plug-in base h250 LSI 4P
HYD321H	Terminal cover plug-in base h630 LSI 3P (400A)
HYD322H	Terminal cover plug-in base h630 LSI 4P (400A)