

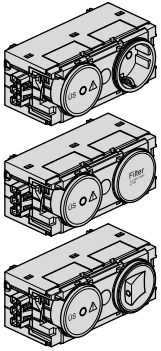
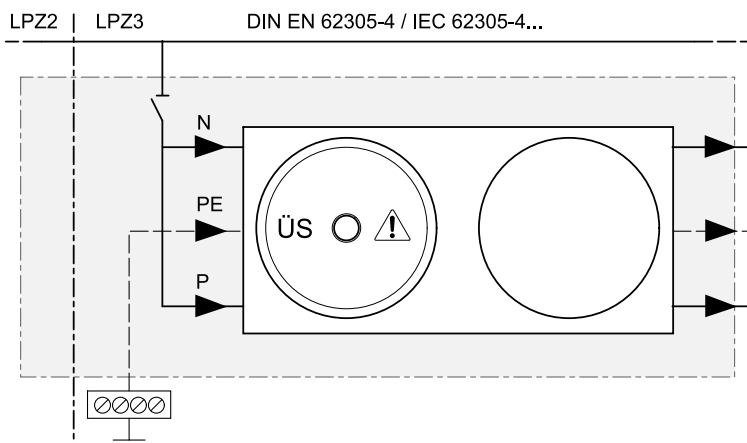
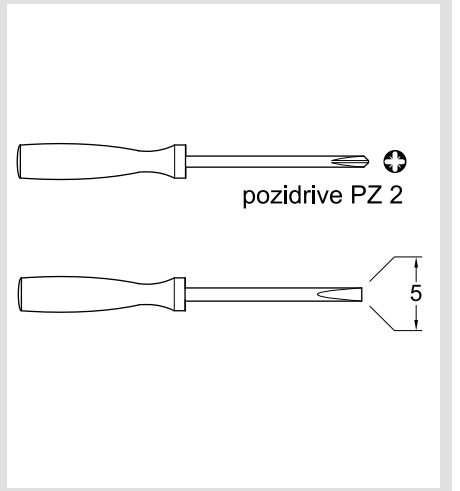
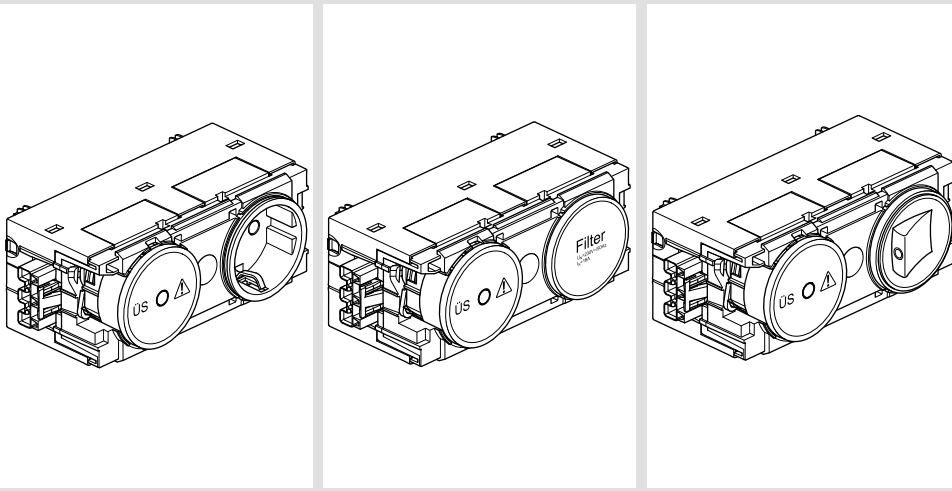


1-41391

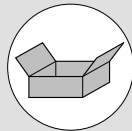

- Ⓛ DE Montageanleitung
- Ⓛ FR Notice d'instructions
- Ⓛ GB Mounting instructions
- Ⓛ NL Montage instructie
- Ⓛ DK Monteringsvejledning
- Ⓛ FI Asennusohje
- Ⓛ NO Montasjeanvisning
- Ⓛ SE Monterings instruktioner
- Ⓛ IT Istruzioni di montaggio
- Ⓛ ES Instrucciones de montaje
- Ⓛ PT Instruções de montagem
- Ⓛ CZ Montážní návod
- Ⓛ BA Uputstvo za montažu

- Ⓛ HR Upute za montažu
- Ⓛ HU Szerelési útmutató
- Ⓛ LT Montavimo instrukcija
- Ⓛ LV Montažas instrukcija
- Ⓛ PL Instrukcja montażowa
- Ⓛ RO Instrucțiuni de montare
- Ⓛ SK Návod na montáž
- Ⓛ RU Инструкция по монтажу
- Ⓛ BG Инструкции за монтаж
- Ⓛ GR Οδηγίες χώνευσης
- Ⓛ SI Navodilo za montažo
- Ⓛ EE Paigaldusjuhised
- Ⓛ IS Leiðbeiningar
- Ⓛ AR دليل التركيب

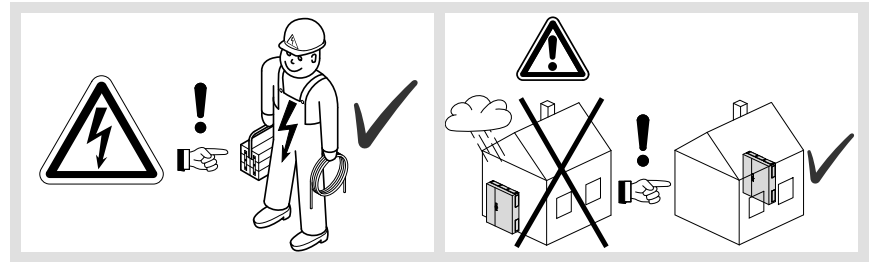

EN 61643-11 IEC 61643-1	Type 3 Class III
TT, TN	OK
F1 max	B16
IP	20
O°C	-25°C / + 65°C
UN (50/60 Hz)	230 V ~
UC 50/60 Hz)	255 V ~
Uoc	L-N 5KV L/N-PE 5KV
Up	L-N ≤ 1,25KV L/N-PE ≤ 1,5KV
In	L-N 2,5KA L/N-PE 2,5KA
I total	L+N-PE 5KA
12 mm	Min. 1,5 mm <sup>2</sup> Max. 2,5 mm <sup>2</sup>

