
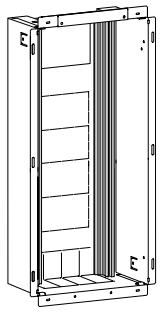
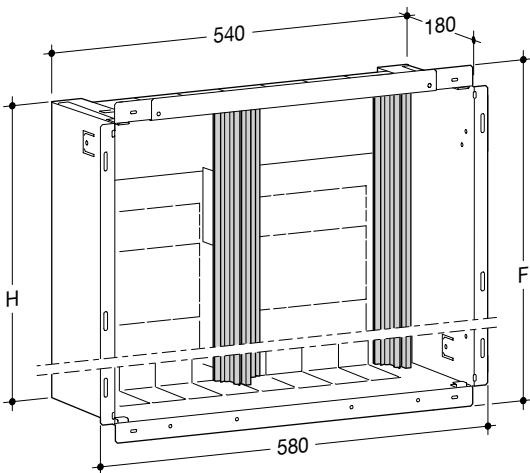
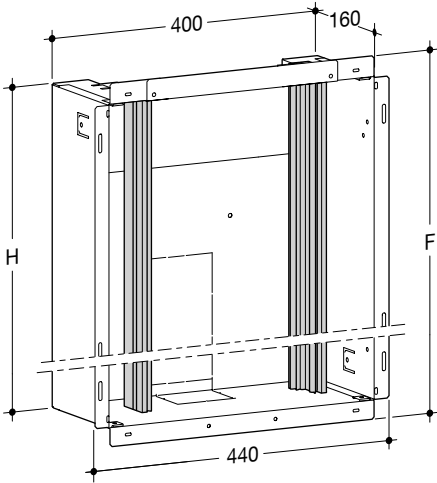



 

- (FR) Bac d'encastrement pour tableau
- (EN) Flush mounting box for enclosure
- (DE) Mauerkasten für Verteiler
- (ES) Cubeta empotrable
- (PT) Caixa base para encastrar


 

6LE00632B



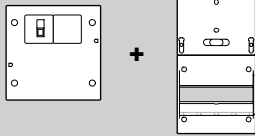










## Gamma 13 + 18

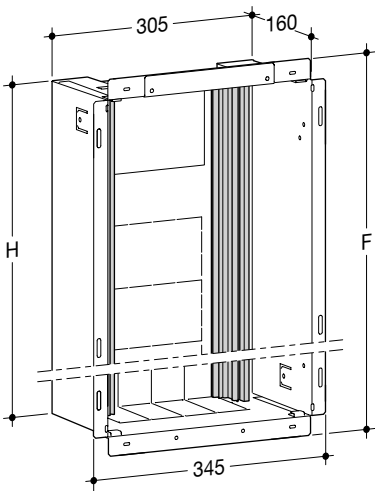

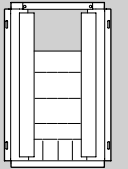
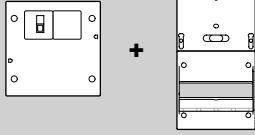
|  |  |  | <b>F</b><br>(mm) | <b>H</b><br>(mm) |
|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|------------------------------------------------------------------------------------|------------------|------------------|
| <b>GE013EN/<br/>GE013P</b>                                                        | GD413.                                                                            | GA01. + GD213.                                                                     | 710              | 670              |
| <b>GE113EN/<br/>GE113P</b>                                                        | GD113.<br>+<br>GD313.                                                             | GA01. + GD113. + TN401<br>GA01. + GD313.                                           | 835              | 795              |
| <b>GE213EN/<br/>GE213P</b>                                                        | GD213.<br>+<br>GD313.                                                             | GA01. + GD213. + TN401<br>GA01. + GD413.                                           | 950              | 910              |
| <b>GE313EN/<br/>GE313P</b>                                                        | GD213.<br>+<br>GD413.                                                             | GA01. + GD313. + TN401                                                             | 1075             | 1035             |
| <b>GE413EN/<br/>GE413P</b>                                                        | GD313.<br>+<br>GD413.                                                             | GA01. + GD413. + TN401                                                             | 1200             | 1160             |

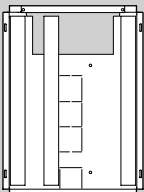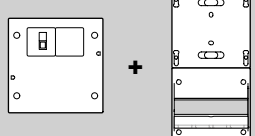
|  |  |  | <b>F</b><br>(mm) | <b>H</b><br>(mm) |
|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------|------------------|------------------|
| <b>GE218EN/<br/>GE218P</b>                                                          | GD218<br>+<br>GD318                                                                 | GA01. + GD218 + TN401                                                                | 950              | 910              |
| <b>GE318EN/<br/>GE318P</b>                                                          | GD218<br>+<br>GD318                                                                 | GA01. + GD218 + TN401                                                                | 1075             | 1035             |
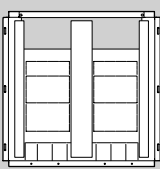
|  |  |  | <b>F</b><br>(mm) | <b>H</b><br>(mm) |
|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------|------------------|------------------|
| <b>GE326EN/<br/>GE326P</b>                                                          | 2x GD313.                                                                           | GA01. + GD213. + TN401<br>GA01. + GD313. + TN401                                     | 575              | 535              |
| <b>GE426EN/<br/>GE426P</b>                                                          | 2x GD413.                                                                           | GA01. + GD413. + TN401                                                               | 710              | 670              |
| <b>GE626EN/<br/>GE626P</b>                                                          | 2x GD113.<br>+<br>2x GD313.                                                         | GA01. + 2 x GD313. +<br>TN401                                                        | 835              | 795              |

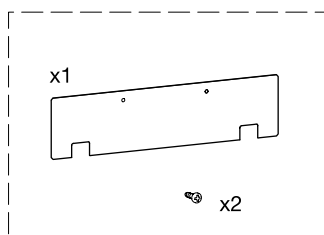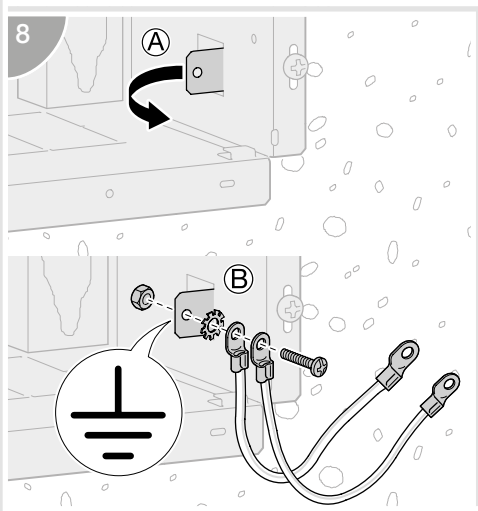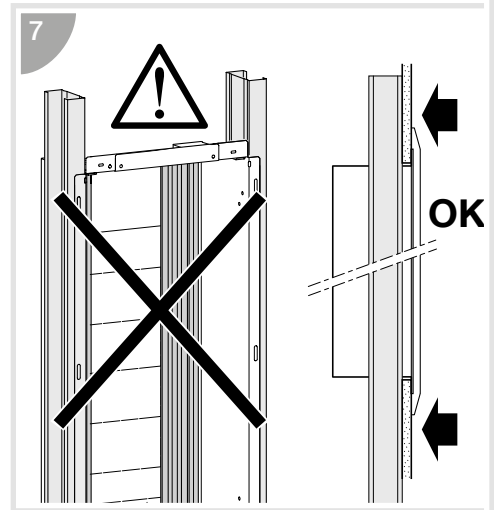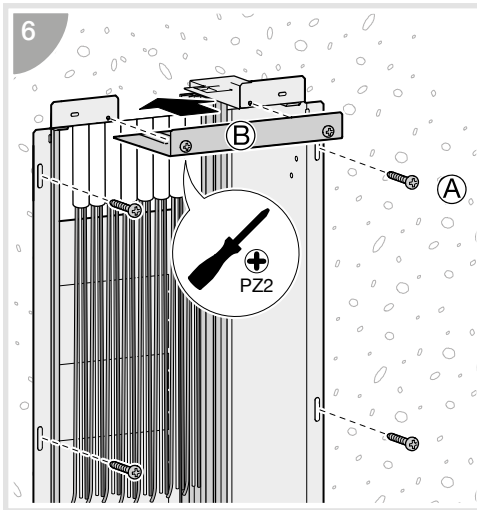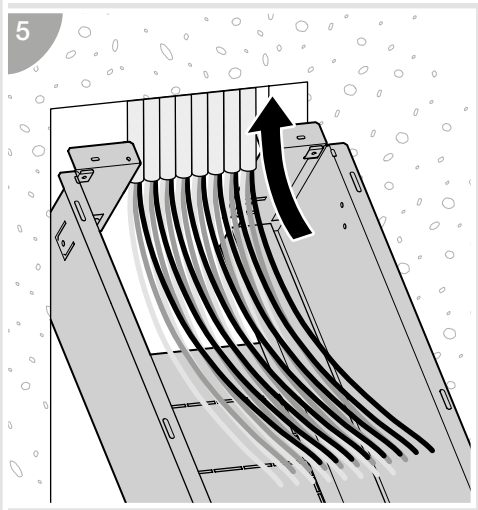
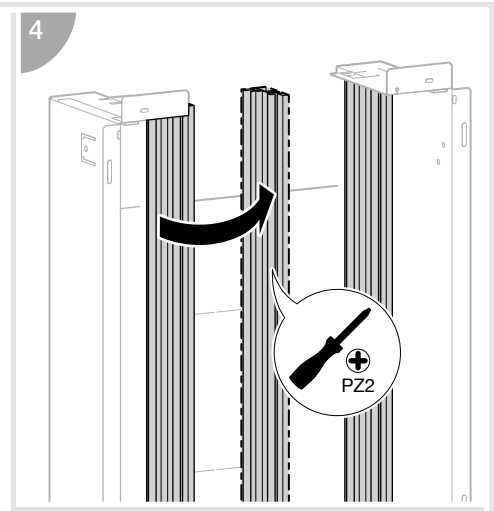
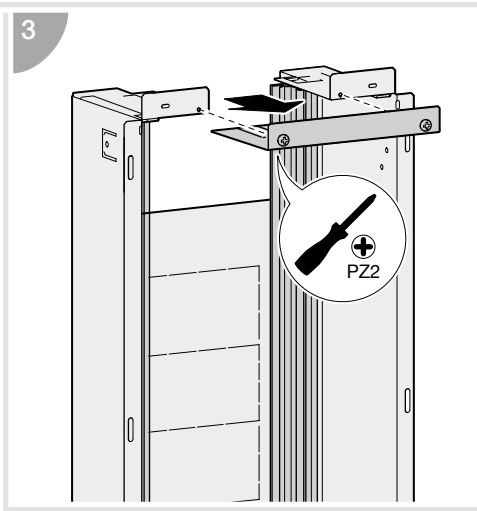
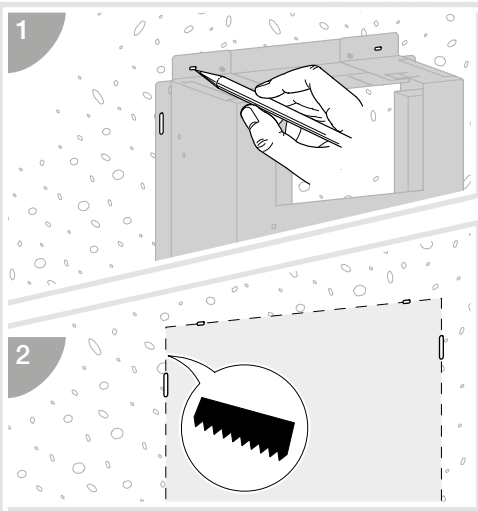


GZ46A

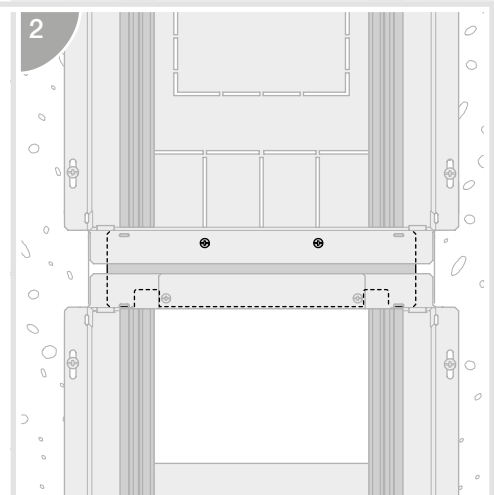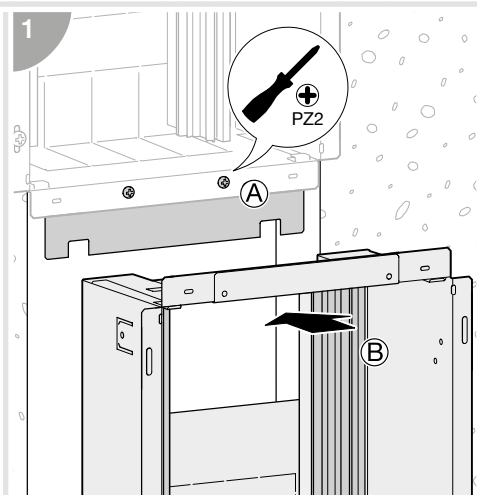

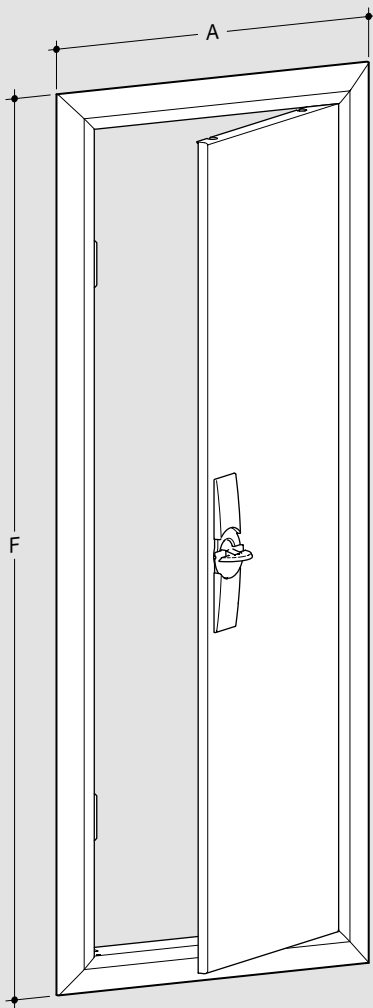

- Ⓡ Cadre-porte pour bac d'encastrement
- Ⓡ Frame door for flush mounting box
- Ⓡ Blendrahmen für Mauerkasten
- Ⓡ Marco/puerta para cubeta
- Ⓡ Aro/porta para caixa base
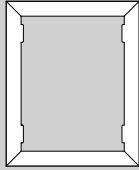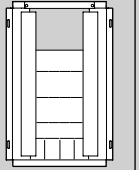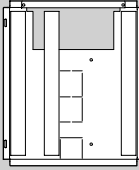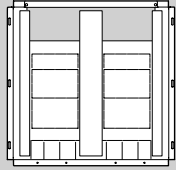
|               |  |  |  |  | <b>A</b><br>(mm) | <b>F</b><br>(mm) |
|---------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|------------------|------------------|
| <b>GF013E</b> |                                                                                   | GE013EN/P                                                                         |                                                                                    |                                                                                     | 375              | 740              |
| <b>GF113E</b> |                                                                                   | GE113EN/P                                                                         |                                                                                    |                                                                                     | 375              | 864              |
| <b>GF213E</b> |                                                                                   | GE213EN/P                                                                         |                                                                                    |                                                                                     | 375              | 977              |
| <b>GF313E</b> |                                                                                   | GE313EN/P                                                                         |                                                                                    |                                                                                     | 375              | 1105             |
| <b>GF413E</b> |                                                                                   | GE413EN/P                                                                         |                                                                                    |                                                                                     | 375              | 1227             |
| <b>GF218E</b> |                                                                                   |                                                                                   | GE218EN/P                                                                          |                                                                                     | 468              | 977              |
| <b>GF318E</b> |                                                                                   |                                                                                   | GE318EN/P                                                                          |                                                                                     | 468              | 1105             |
| <b>GF326E</b> |                                                                                   |                                                                                   |                                                                                    | GE326EN/P                                                                           | 608              | 602              |
| <b>GF426E</b> |                                                                                   |                                                                                   |                                                                                    | GE426EN/P                                                                           | 608              | 740              |
| <b>GF626E</b> |                                                                                   |                                                                                   |                                                                                    | GE626EN/P                                                                           | 608              | 864              |

