


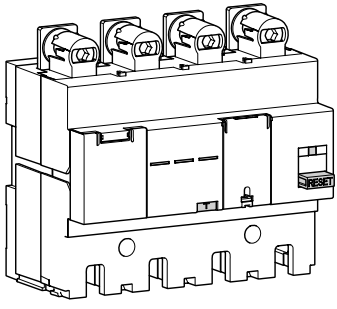
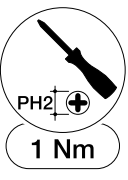
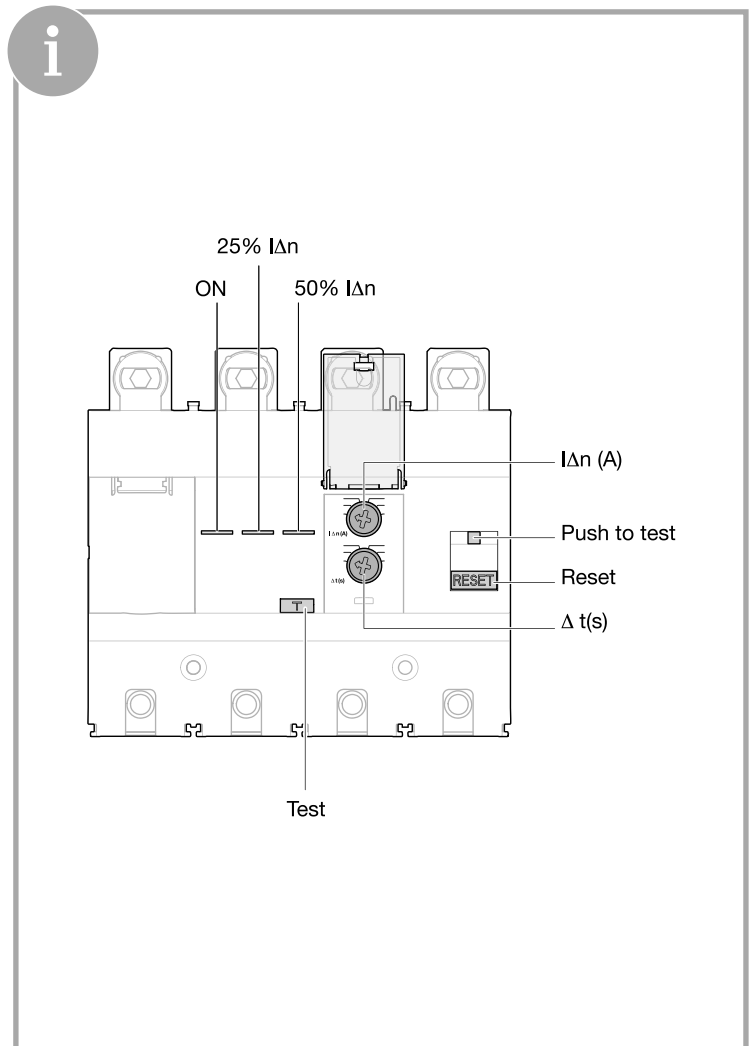
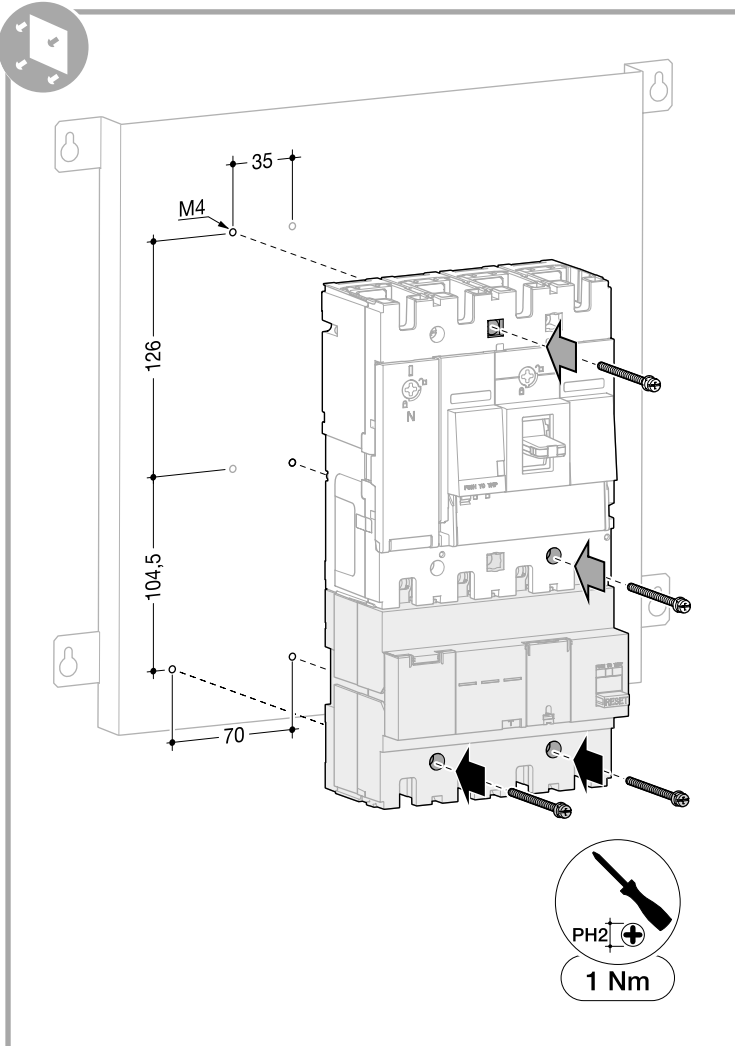
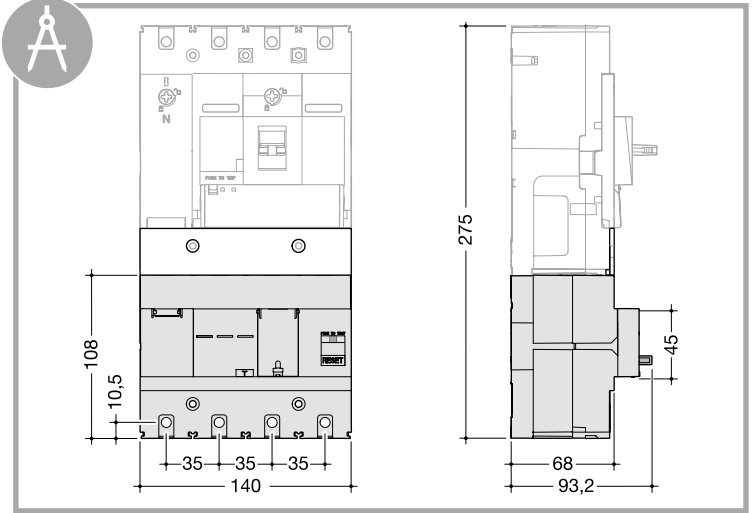
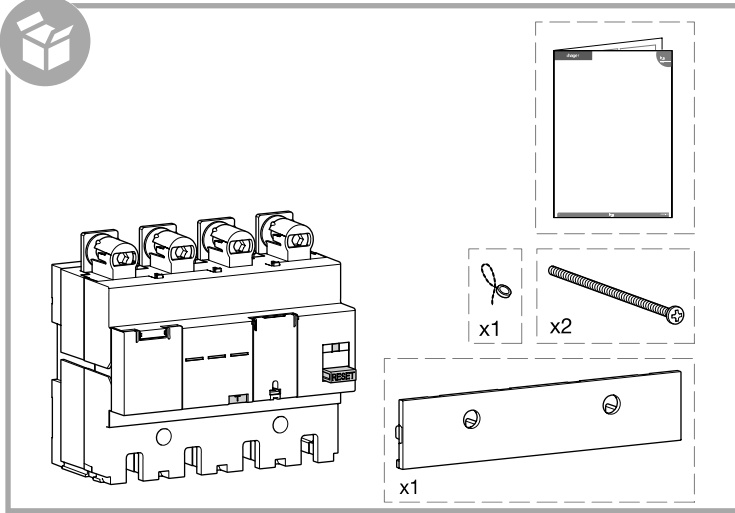
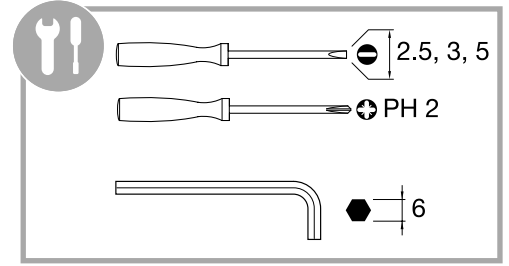
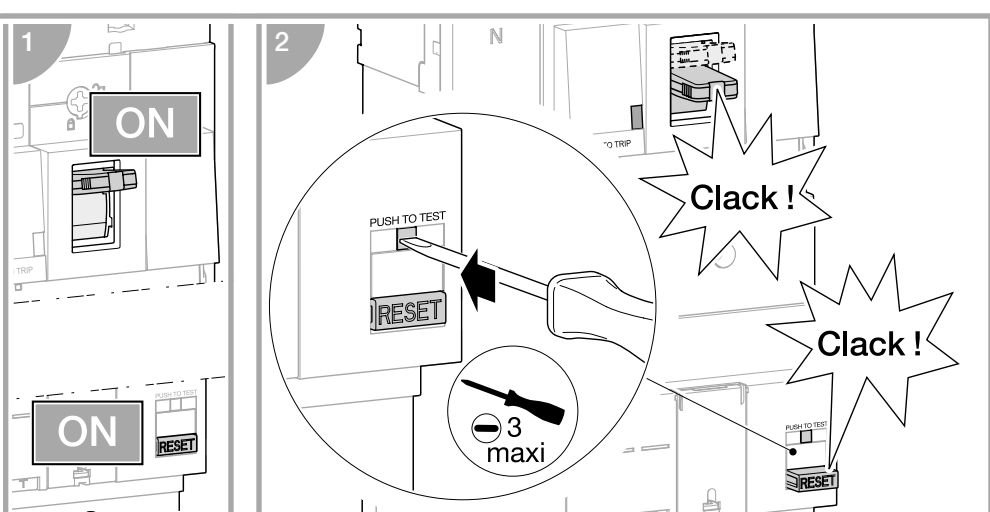
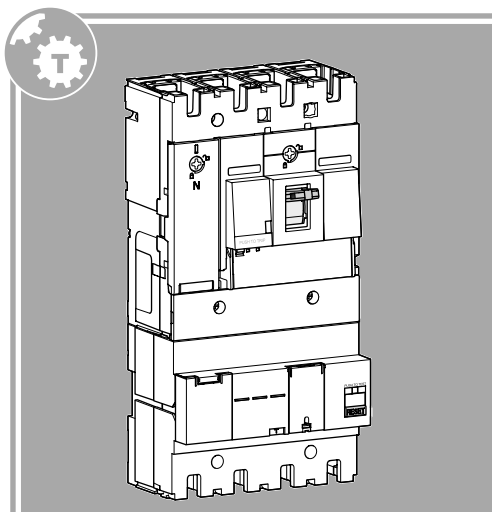
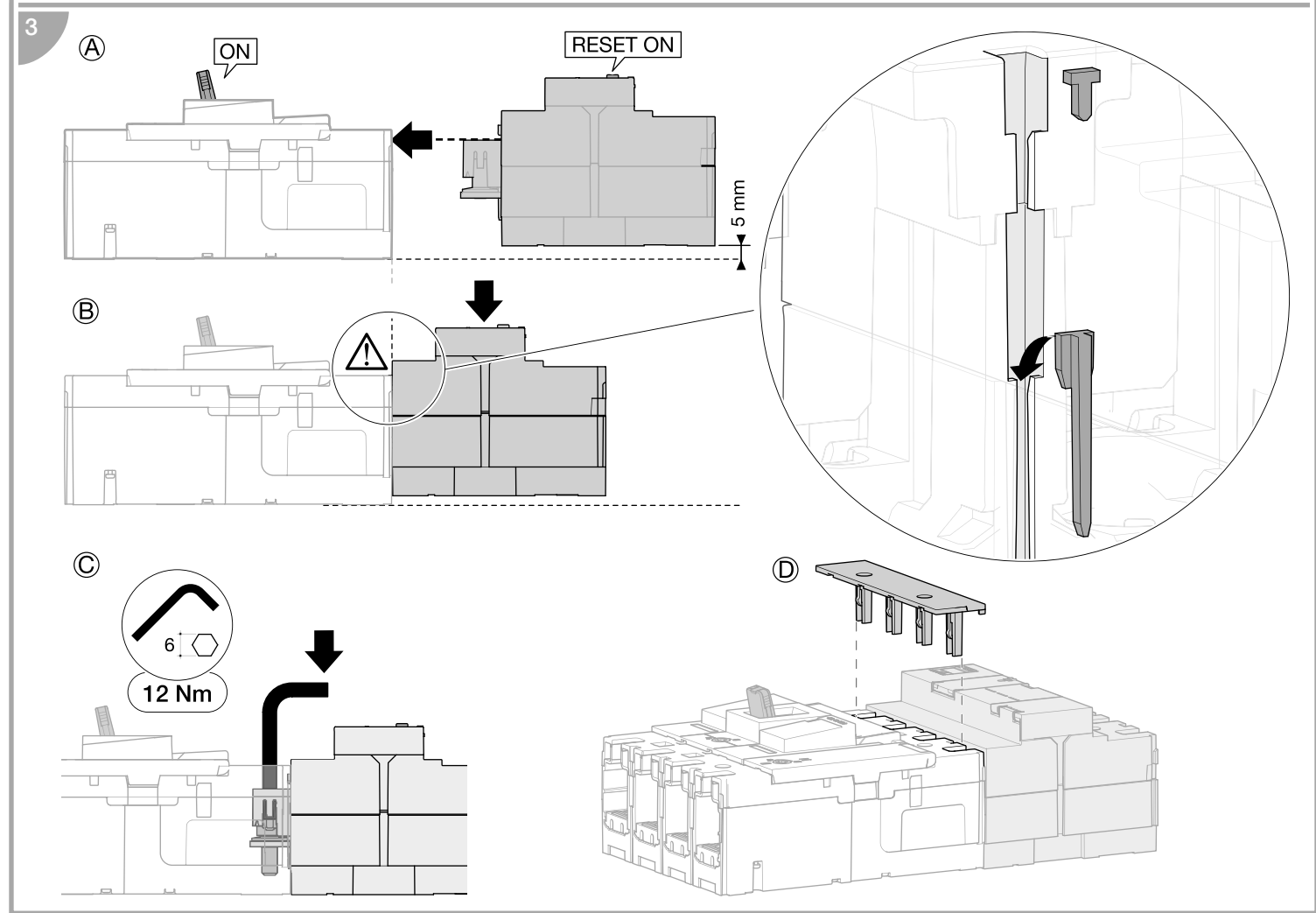








6LE002258Ac

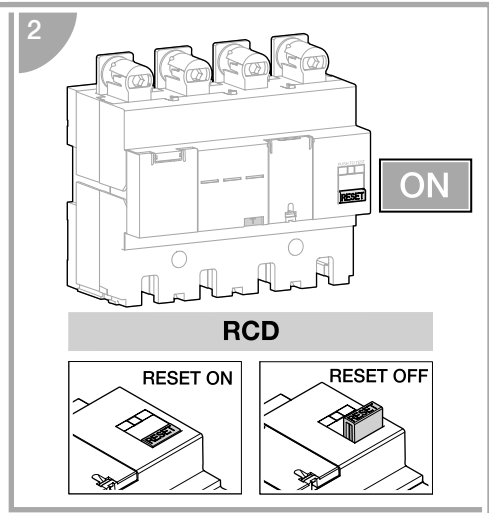




P250






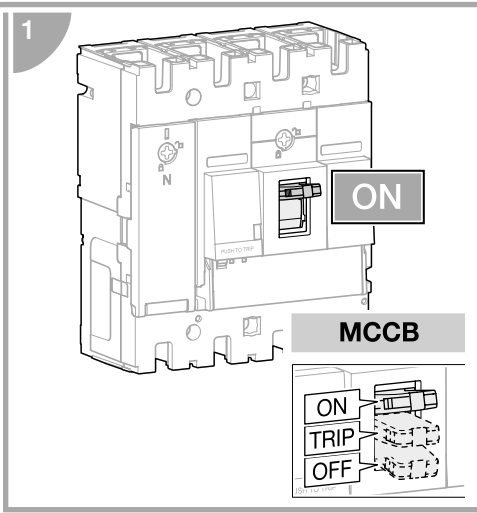


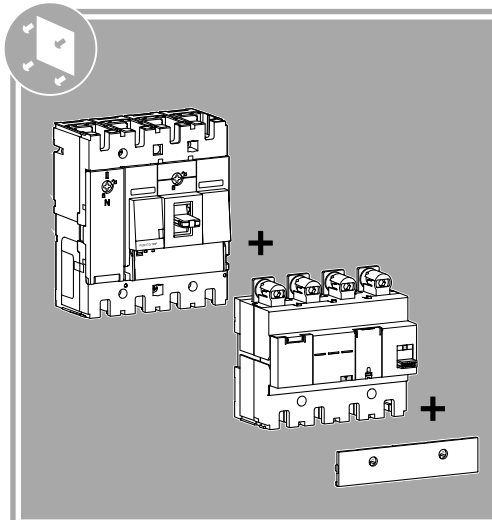


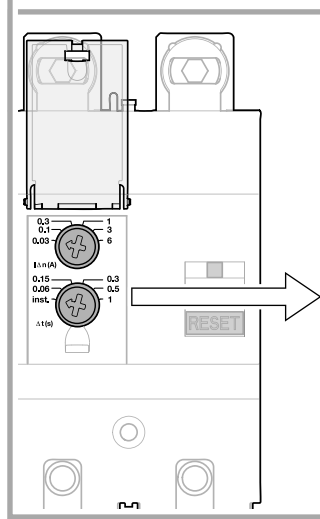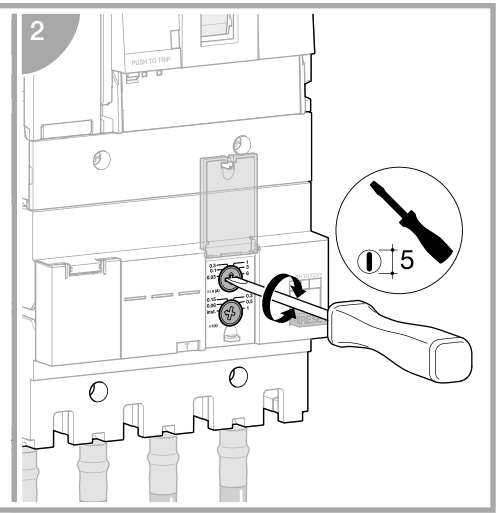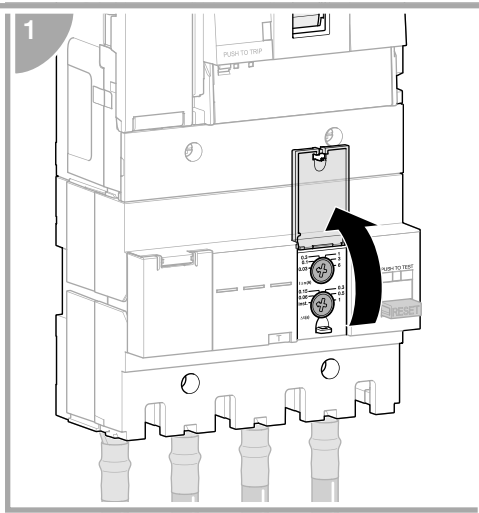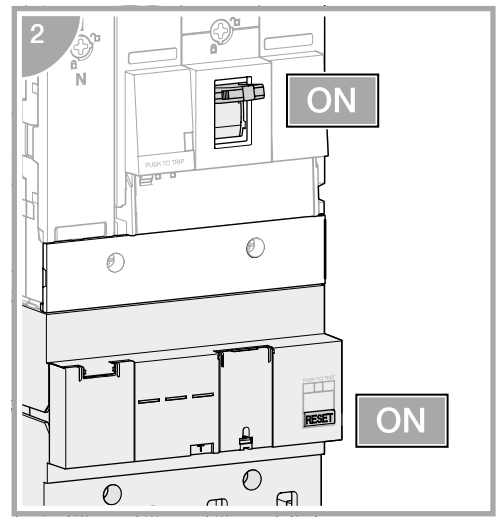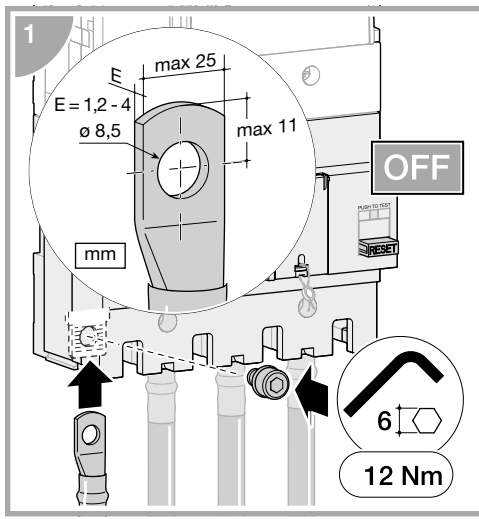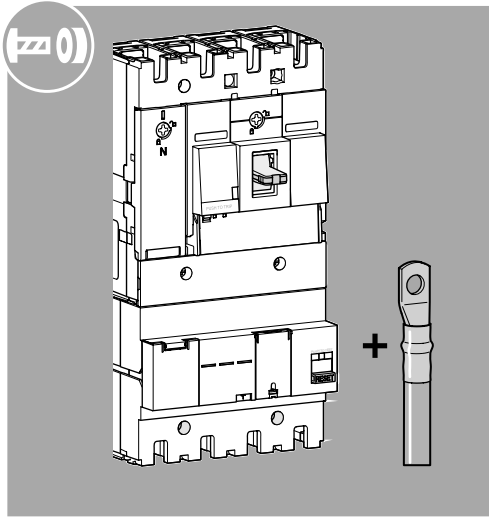


S (Δt)	A ($I\Delta n$)					
	0,03	0,1	0,3	1	3	6
inst.	✓	✓	✓	✓	✓	✓
0,06	✗	✓	✓	✓	✓	✓
0,15	✗	✓	✓	✓	✓	✓
0,3	✗	✓	✓	✓	✓	✓
0,5	✗	✓	✓	✓	✓	✓
1	✗	✓	✓	✓	✓	✓

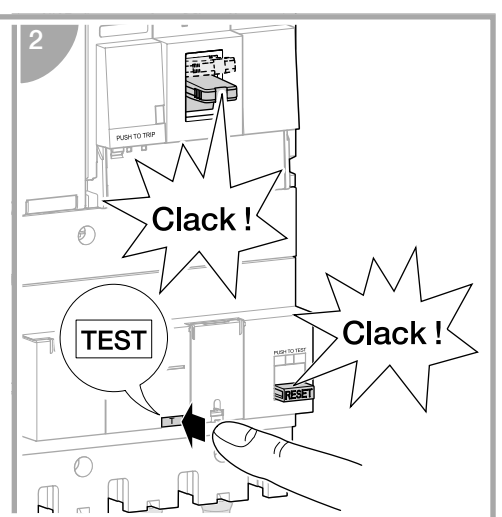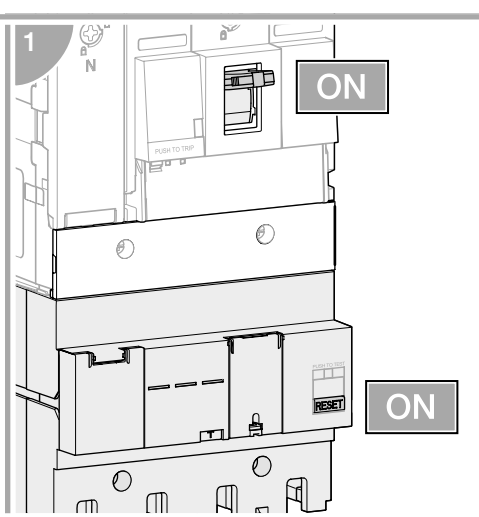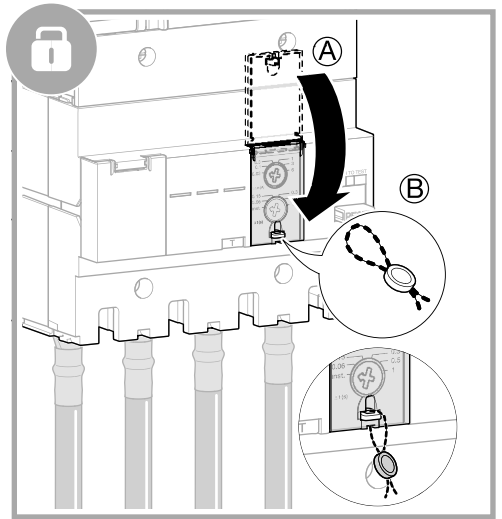

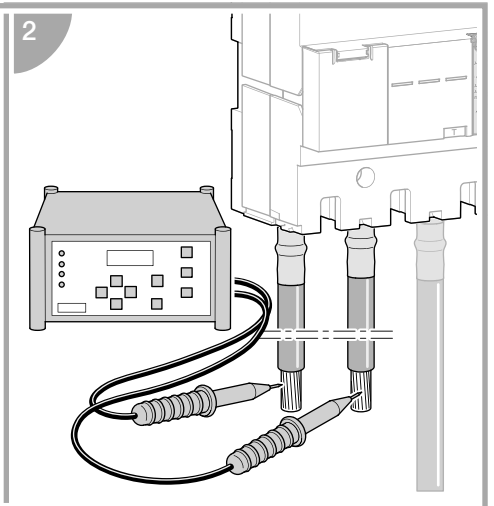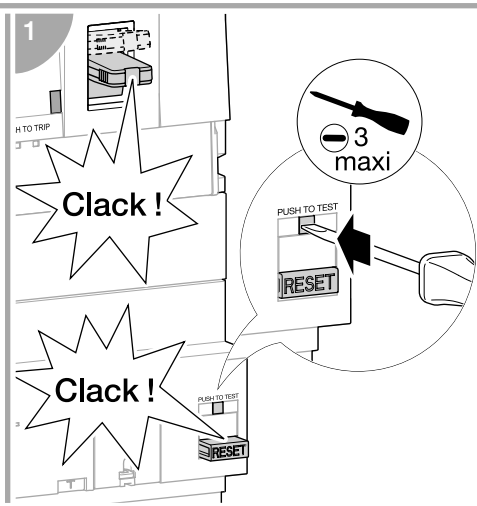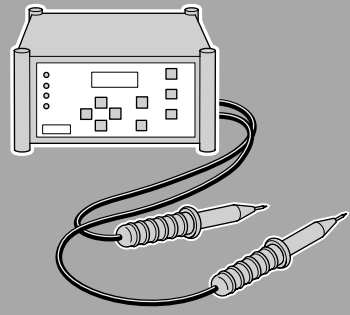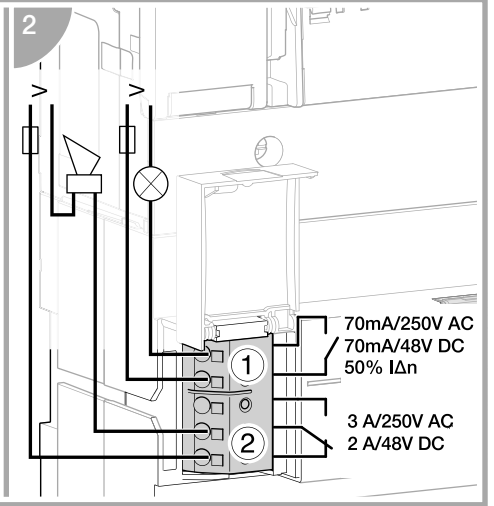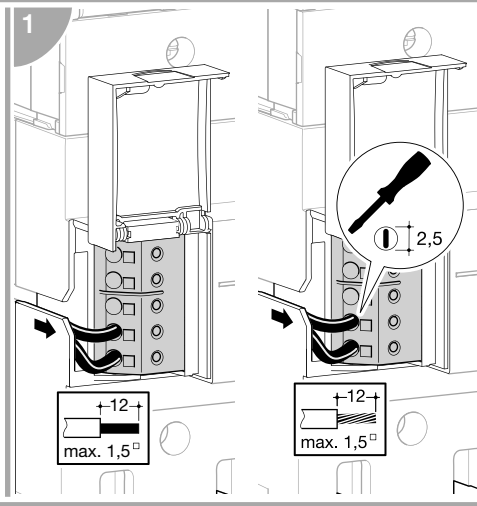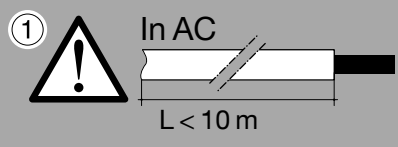

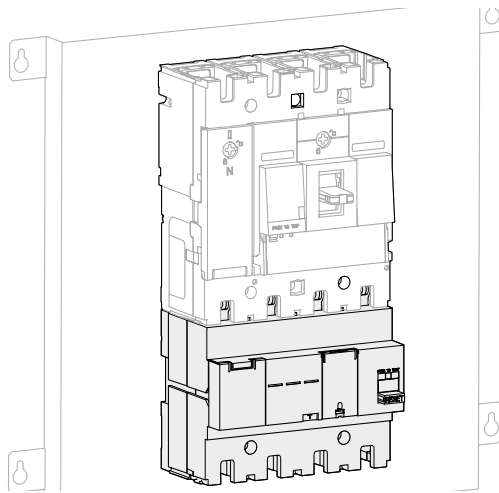


HYB010H

 

x4

HYB012H

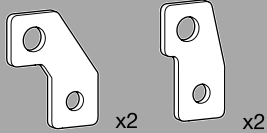


x2

x2



HYT006H

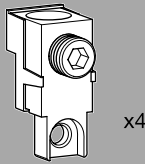

x4

+




Cu


	min.	max.
	(mm ²)	
	50	185
	50	185



HYT019H

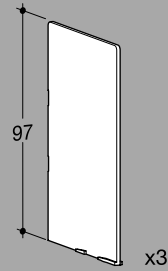

HYT002H

 

x4

+




x4

Cu
Al

	min.	max.
	(mm ²)	
	10	120
	10	150

HYT008H

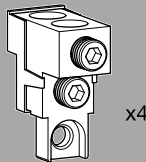

x4

+




Cu
Al

	min.	max.
	(mm ²)	
	35	95
	35	120




HYT051H

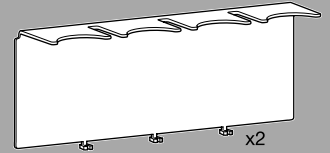


x2

HYT022H

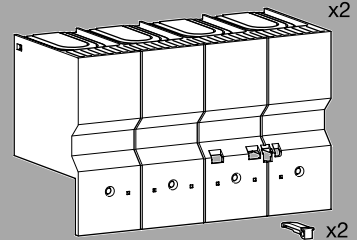


x2

HYT026H

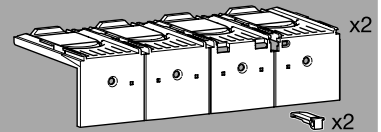


x2

HYT024H

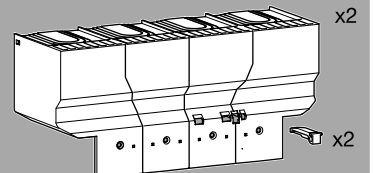

x2

HYT066H

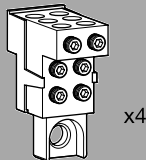

x4

+



Cu
Al

	min.	max.
	(mm ²)	
	6	35
	6	35

