


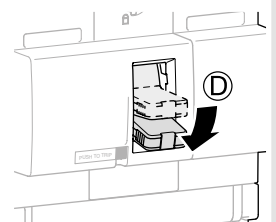
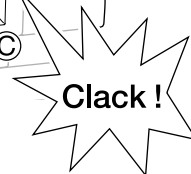
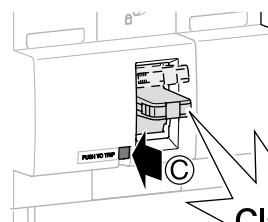
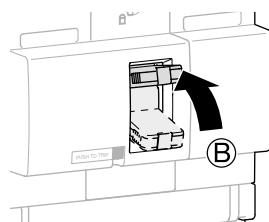
 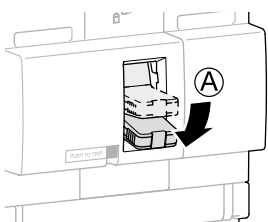
 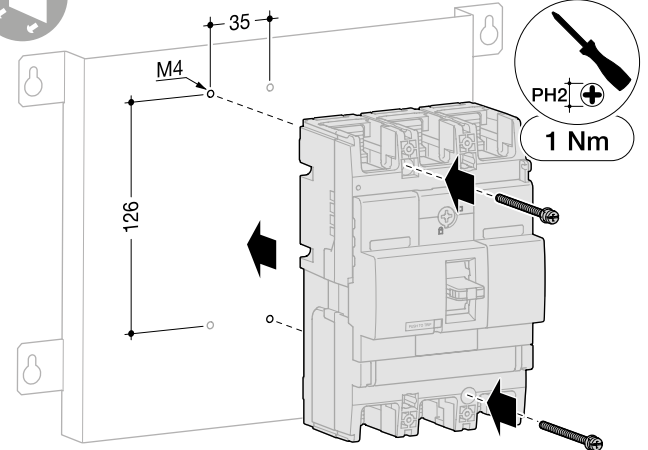
 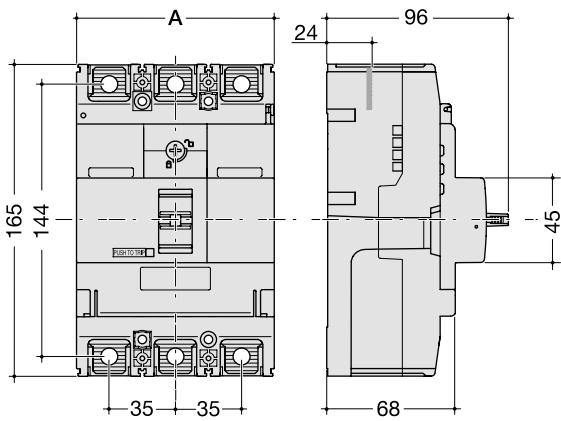



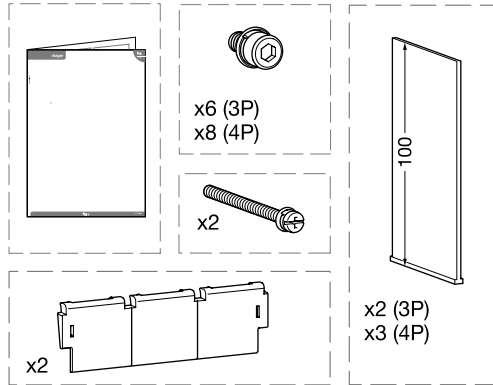
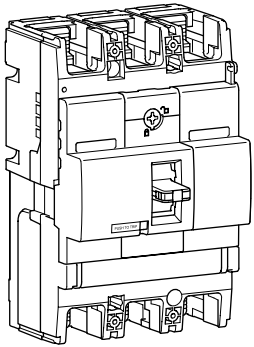
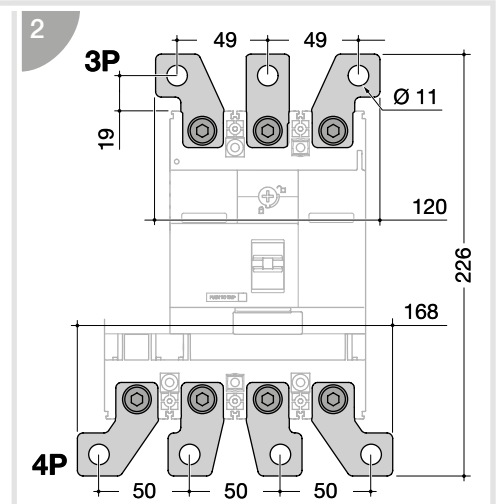
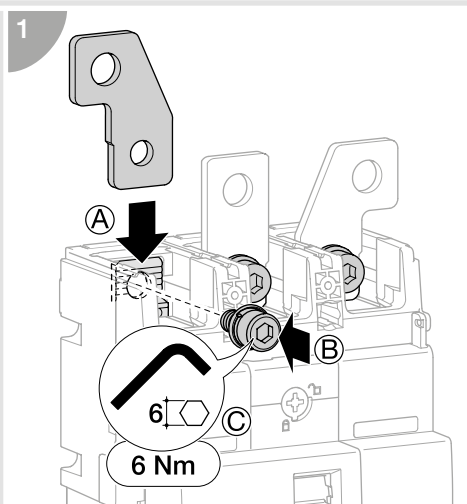
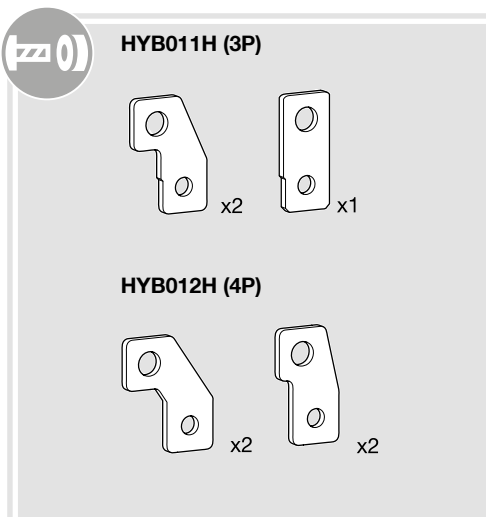
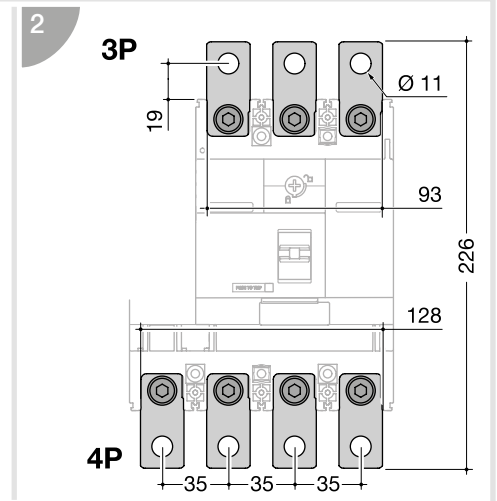
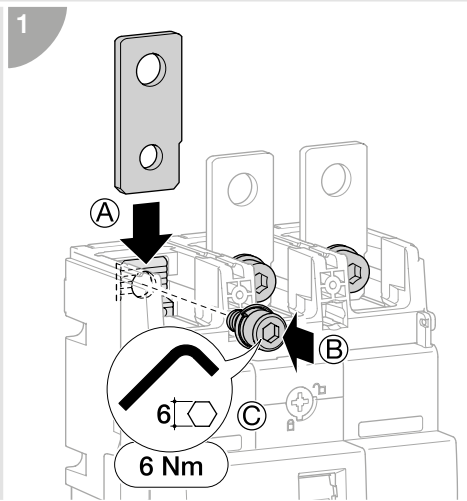
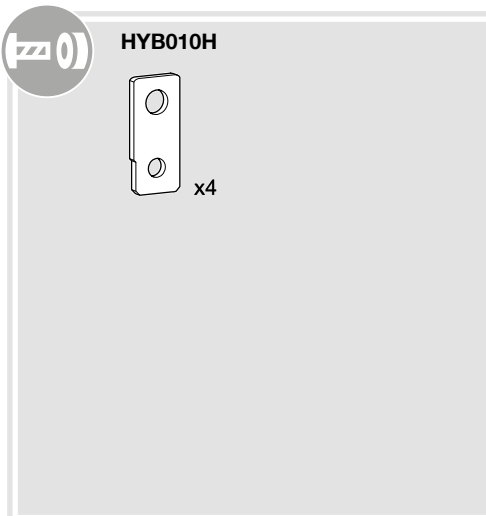
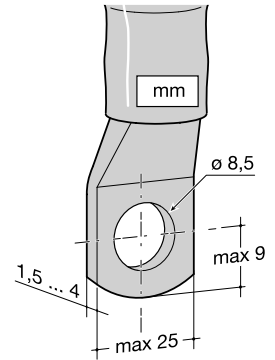
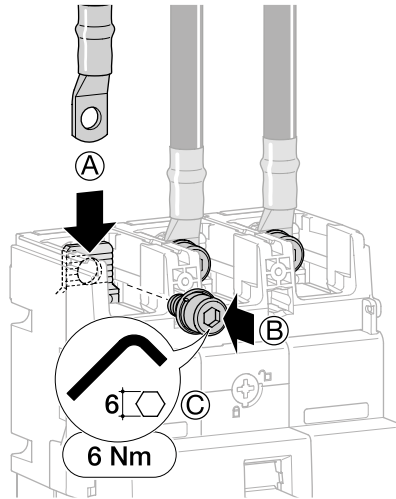
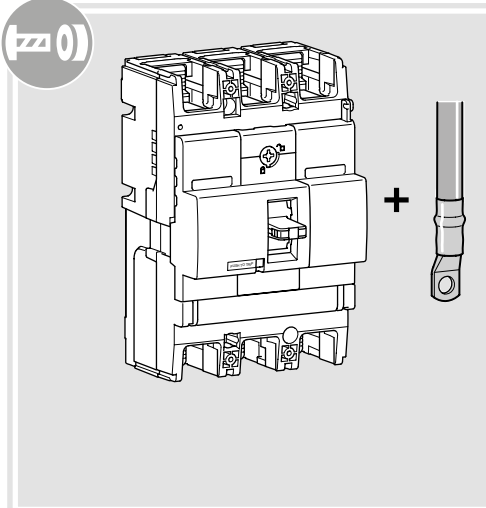





3P-4P






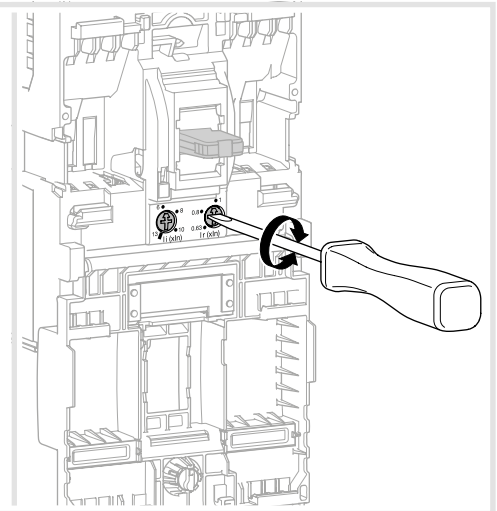


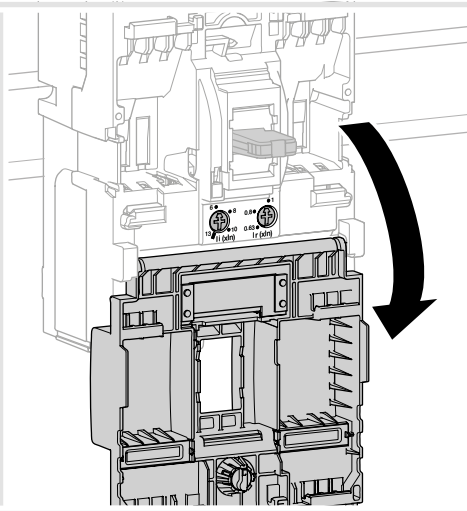

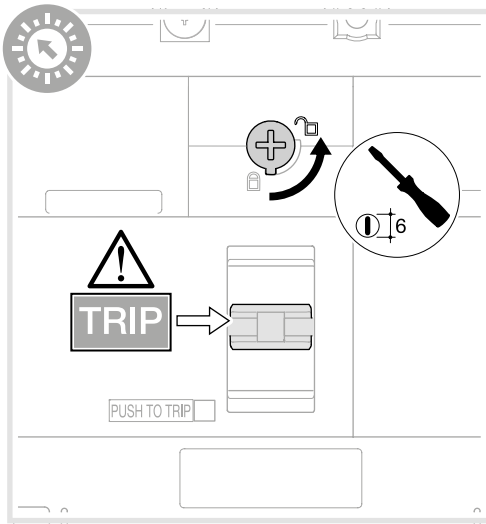

  
HYB031H (3P)
HYB032H (4P)

-  x2
-  x1 (3P)
x2 (4P)
-  x3 (3P)
x4 (4P)

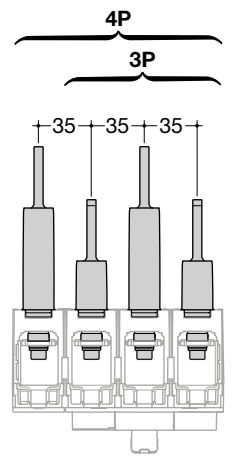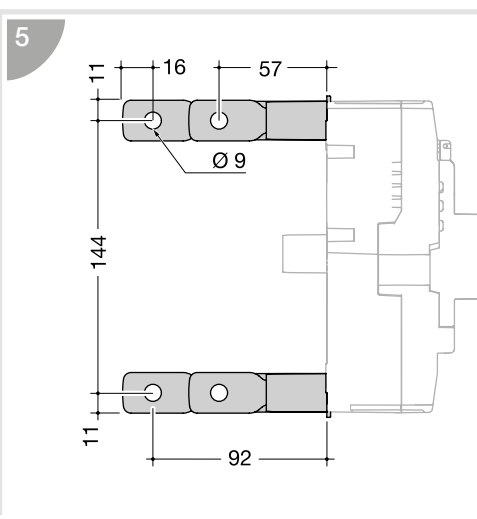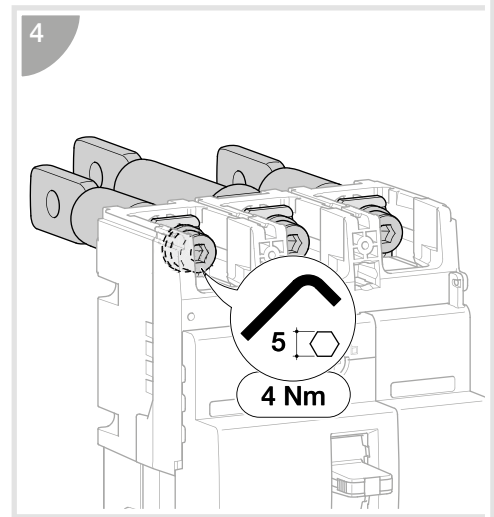
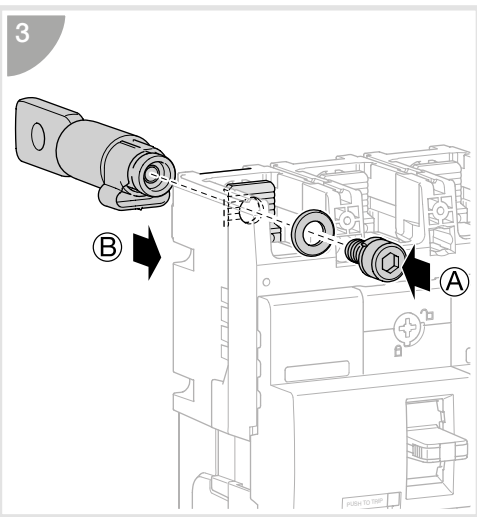
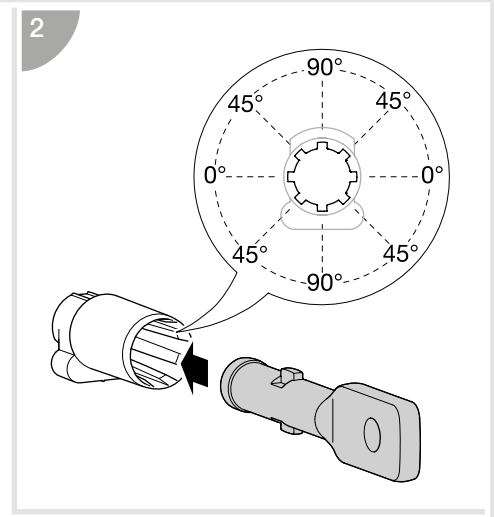
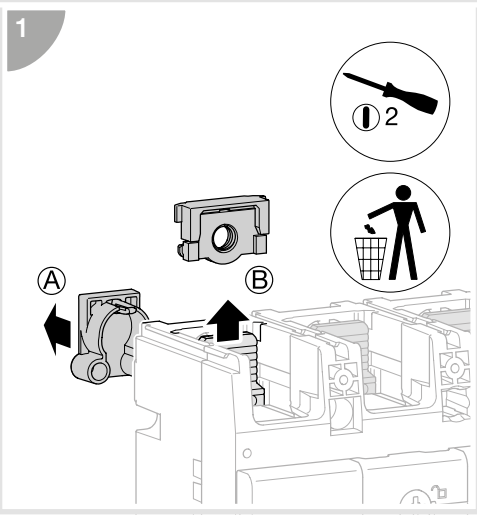





HYB001H (3P)
HYB002H (4P)

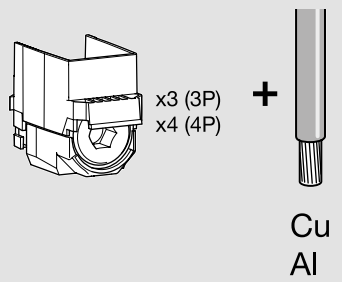



	min.	max.
	(mm ²)	
	35	150
	35	185

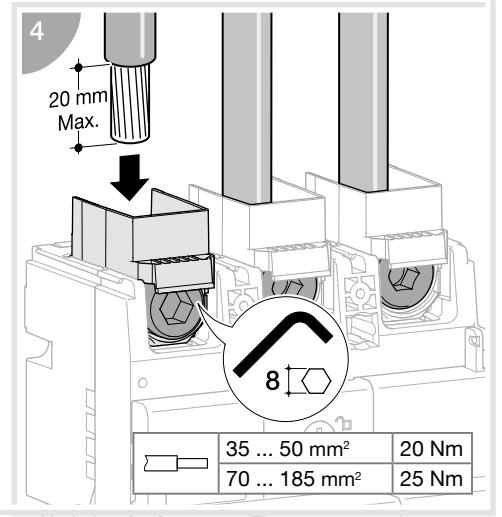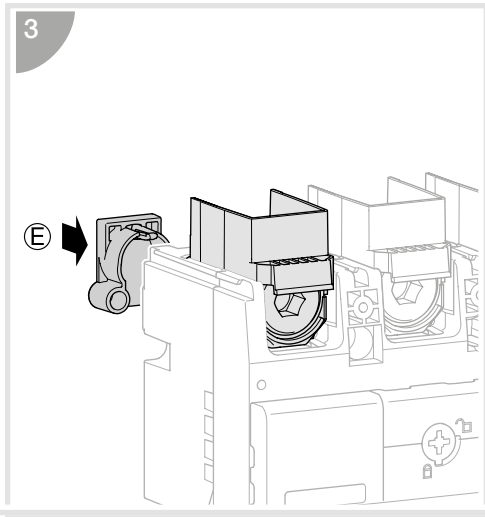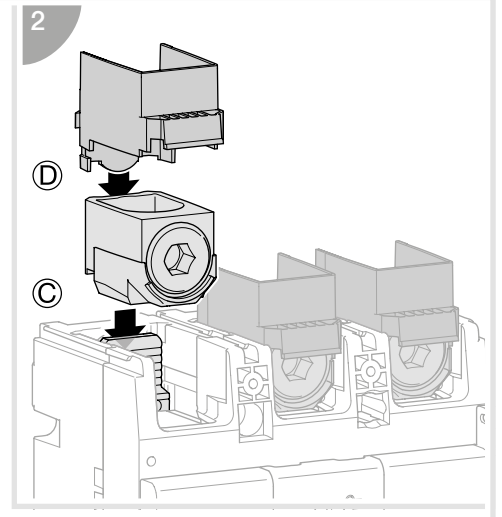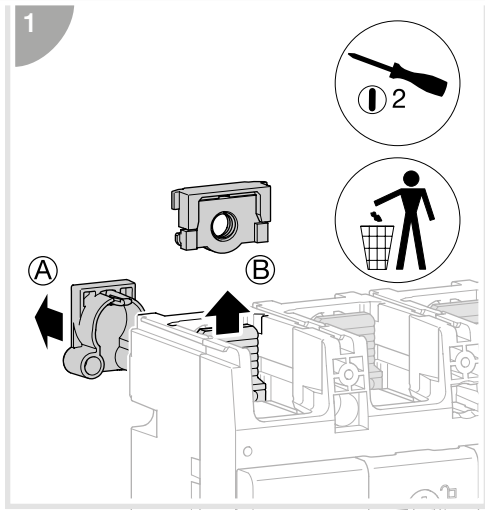


HYB005H (3P)
HYB006H (4P)

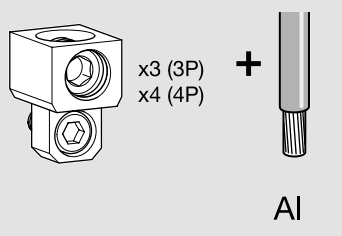


	min.	max.
	(mm ²)	
	95	240
	95	240

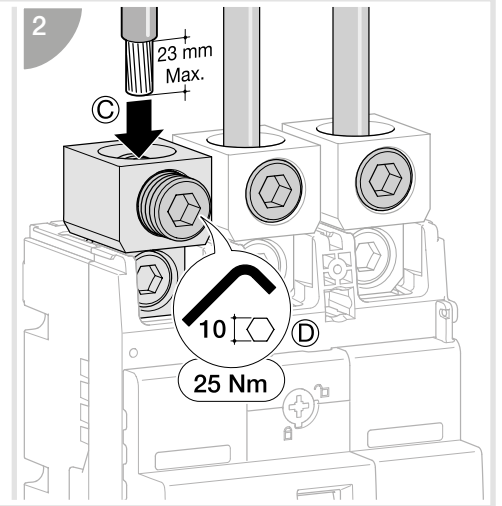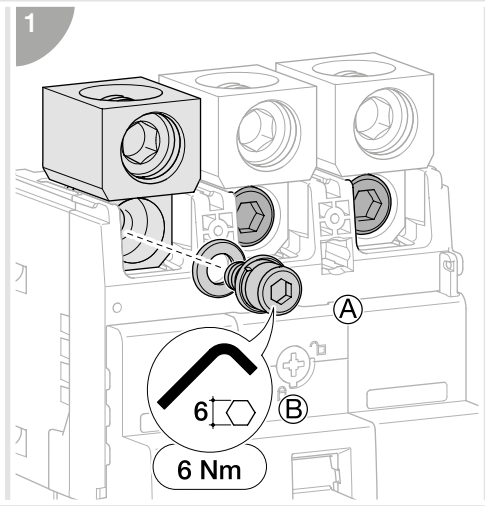


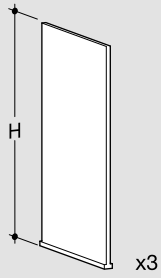


	H (mm)
	100
3P/4P	HYB019H

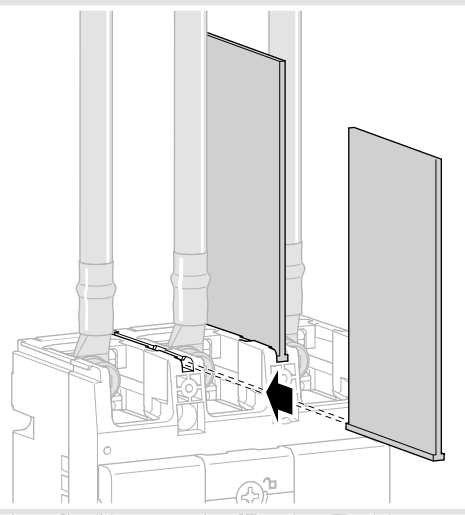





HYB027H (3P)
HYB028H (4P)

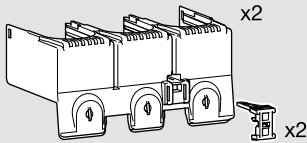

HYB023H (3P)
HYB024H (4P)

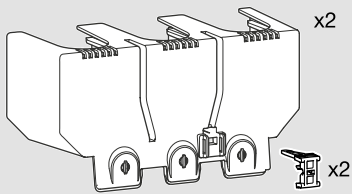

HYB021H (3P)
HYB022H (4P)

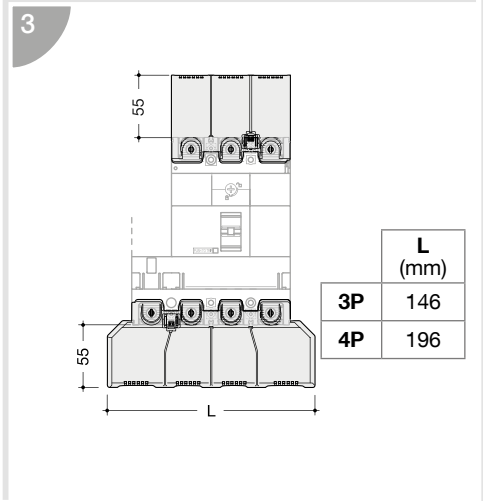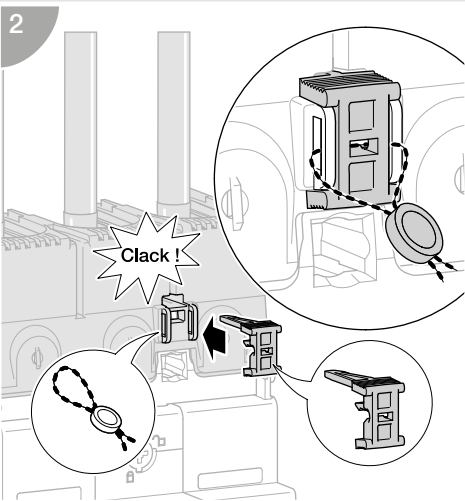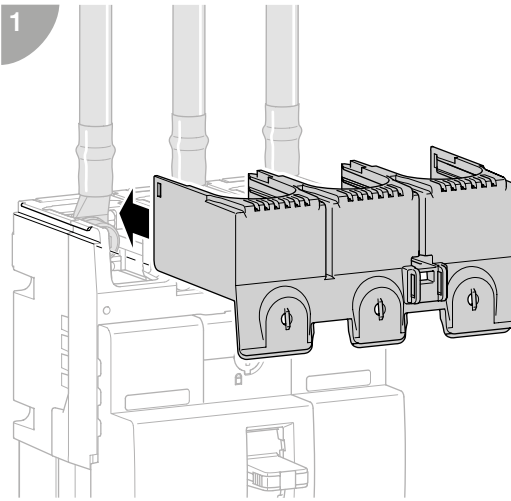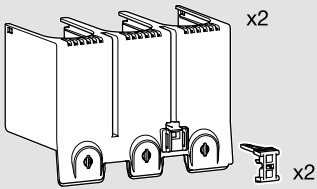

HYB025H (3P)
HYB026H (4P)

