

## Verdrahtungskanalreihe BA6

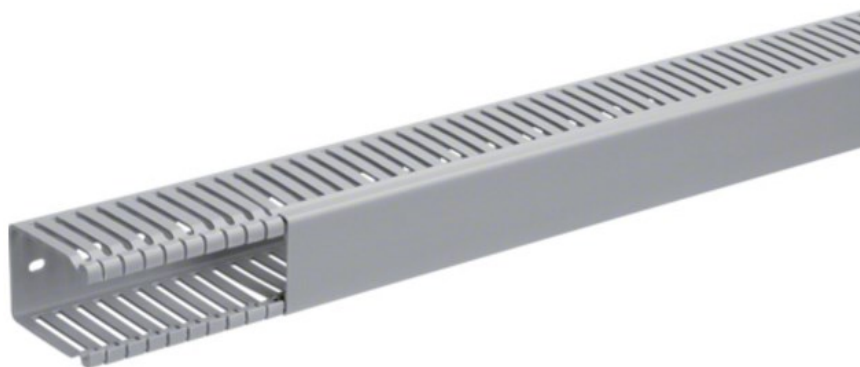


Abb.1: BA66004007030B



- Prüfung nach EN 50085-2-3
- Bodenlochung nach EN 50085
- Selbstverlöschend nach UL94 V0
- Anwendungstemperatur: - 5°C bis + 60°
- UL listed File-Nr.: E48414
- CSA listed File-Nr.: 22009

Unterteil+Oberteil			
Referenz	Höhe	Breite	Länge
BA61501507030B	18 mm	15 mm	2000 mm
BA62002507030B	21 mm	32 mm	2000 mm
BA63001507030B	33 mm	20 mm	2000 mm
BA63002507030B	33 mm	25 mm	2000 mm
BA63004007030B	33 mm	47 mm	2000 mm
BA64001507030B	43 mm	20 mm	2000 mm
BA64002507030B	43 mm	31 mm	2000 mm
BA64004007030B	43 mm	47 mm	2000 mm
BA64006007030B	43 mm	67 mm	2000 mm
BA64008007030B	44 mm	88 mm	2000 mm
BA64012007030B	44 mm	129 mm	2000 mm
BA66001507030B	63 mm	20 mm	2000 mm
BA66002507030B	64 mm	31 mm	2000 mm
BA66004007030B	64 mm	47 mm	2000 mm
BA66006007030B	64 mm	67 mm	2000 mm
BA66008007030B	64 mm	88 mm	2000 mm
BA66010007030B	65 mm	108 mm	2000 mm
BA66012007030B	65 mm	129 mm	2000 mm
BA66015007030B	65 mm	159 mm	2000 mm
BA66020007030B	65 mm	209 mm	2000 mm
BA68002507030B	84 mm	31 mm	2000 mm
BA68004007030B	84 mm	47 mm	2000 mm
BA68006007030B	84 mm	67 mm	2000 mm
BA68008007030B	84 mm	88 mm	2000 mm
BA68010007030B	85 mm	108 mm	2000 mm
BA68012007030B	85 mm	129 mm	2000 mm

Oberteil		
Referenz	Breite	Länge
B1501527030	15 mm	2000 mm
B2002527030	32 mm	2000 mm
B3002527030	31 mm	2000 mm
B4004027030	47 mm	2000 mm
B4006027030	67 mm	2000 mm
B4008027030	88 mm	2000 mm
B6010027030	108 mm	2000 mm
B4012027030	129 mm	2000 mm
B6015027030	159 mm	2000 mm
B6020027030	120 mm	2000 mm

für BA62025

Drahthalteklammer	
Referenz	Zubehör zu
B400403	BA64004007030B
B400603	BA64006007030B
B400803	BA64008007030B
B401203	BA64012007030B
B600403	BA66004007030B
B600603	BA66006007030B
B600803	BA66008007030B
B601003	BA66010007030B
B601203	BA66012007030B
B800403	BA68004007030B
B800603	BA68006007030B
B800803	BA68008007030B
B801203	BA68012007030B


Abschlussplatte	
Referenz	Zubehör zu
B1501547030	BA61501507030B
B2002547030	BA62002507030B
B3001547030	BA63001507030B
B3002547030	BA63002507030B
B4002547030	BA64002507030B
B4004047030	BA64004007030B
B4006047030	BA64006007030B
B4008047030	BA64008007030B
B4012047030	BA64012007030B
B6002547030	BA66002507030B
B6004047030	BA66004007030B
B6006047030	BA66006007030B
B6008047030	BA66008007030B
B6010047030	BA66010007030B
B6012047030	BA66012007030B
B8008047030	BA68008007030B
B8012047030	BA68012007030B




Abb. 2: B6004047030



 
Abb. 3: B600403




for duct width 15 mm

 


for duct width 25 mm

 


for duct width 40 mm

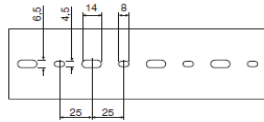


for duct width 60 mm

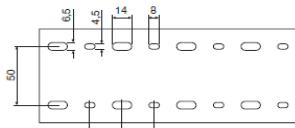


for duct width 80 mm

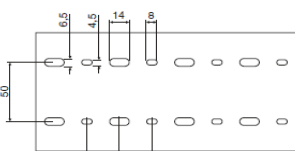


for duct width 100 mm

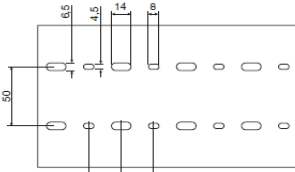

for duct width 120 mm

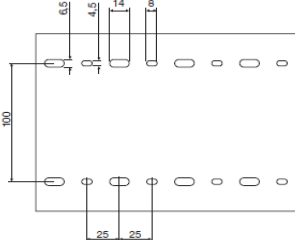


for duct width 150 mm

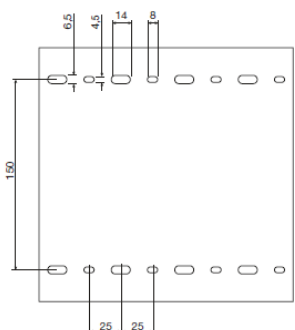


for duct width 200 mm



 
for duct height 15 mm




for duct height 20 mm

 


for duct height 30 mm

 

for duct height 40 mm

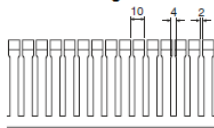

for duct height 60 mm

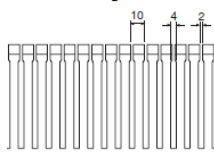

for duct height 80 mm

