

Slotted Trunking BA7B



Abb. 1: BA7B80080



- certified according to EN 50085-2-3
- base holes according to EN 50085
- self-extinguishing according to UL94 V0
- application temperature: - 5°C bis + 60°
- UL listed File-Nr.: E48414 (all colors)
- CSA listed File-Nr.: 22009 (all colors)

Unterteil+Oberteil			
Referenz	Höhe	Breite	Länge
BA7B40025	40 mm	25 mm	2000 mm
BA7B40040	40 mm	40 mm	2000 mm
BA7B40060	40 mm	60 mm	2000 mm
BA7B40080	40 mm	80 mm	2000 mm
BA7B60025	60 mm	25 mm	2000 mm
BA7B60040	60 mm	40 mm	2000 mm
BA7B60060	60 mm	60 mm	2000 mm
BA7B60080	60 mm	80 mm	2000 mm
BA7B60100	60 mm	100 mm	2000 mm
BA7B80025	80 mm	25 mm	2000 mm
BA7B80040	80 mm	40 mm	2000 mm
BA7B80060	80 mm	60 mm	2000 mm
BA7B80080	80 mm	80 mm	2000 mm
BA7B80100	80 mm	100 mm	2000 mm
BA7B80120	80 mm	120 mm	2000 mm
BA7B100040	100 mm	40 mm	2000 mm
BA7B100060	100 mm	60 mm	2000 mm
BA7B100080	100 mm	80 mm	2000 mm
BA7B100100	100 mm	100 mm	2000 mm

Oberteil		
Referenz	Breite	Länge
BA70252	25 mm	2000 mm
BA70402	40 mm	2000 mm
BA70602	60 mm	2000 mm
BA70802	80 mm	2000 mm
BA71002	100 mm	2000 mm
BA71202	120 mm	2000 mm



Abb. 2: BA7B60060




Abb.3: BA70602




Web breakable until first scoreline without tools




Web breakable until bottom with tools

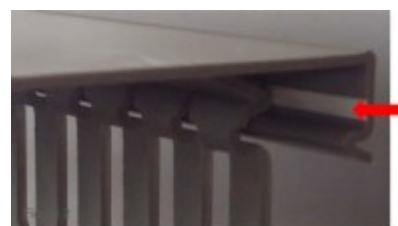


Soft-component prevents slide of the lid even in case of vibrations

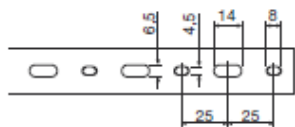


for duct width 25 mm

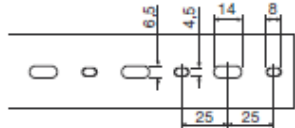


for duct width 40 mm

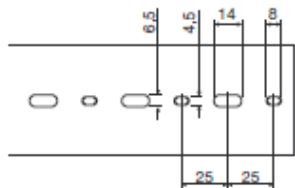


for duct width 60 mm

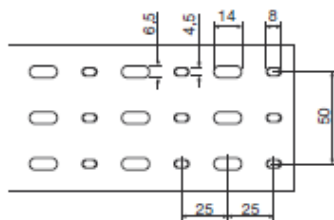

for duct width 80 mm

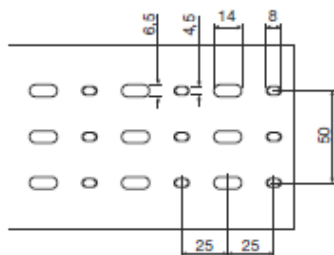


for duct width 100 mm

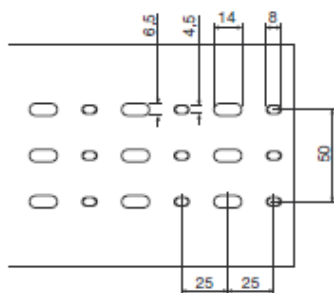


for duct width 120 mm



 
for duct height 25 mm




for duct height 40 mm

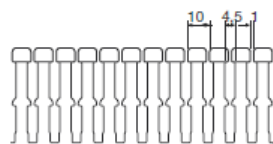

for duct height 60 mm

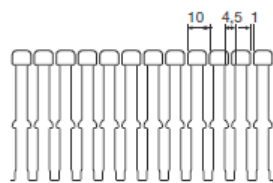

for duct height 80 mm

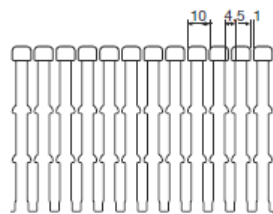

for duct height 100 mm

