

Slotted Trunking LKG

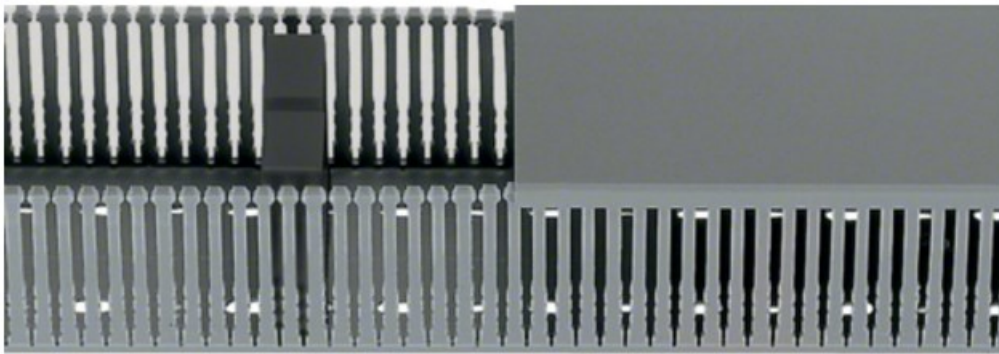


Fig. 1: LKG3702507030B



- certified according to EN 50085-2-3
- wiring duct dimensions according to DIN 43659
- base holes according to EN 50085
- self-extinguishing according to UL94 V0
- temperature-resistant - 25°C bis + 60°
- CSA gellistet File-Nr.: 22009

| Base+Cover | | | |
|----------------|--------|--------|---------|
| Reference | Height | Width | Length |
| LKG3702507030B | 37 mm | 25 mm | 2000 mm |
| LKG3703707030B | 37 mm | 35 mm | 2000 mm |
| LKG3705007030B | 37 mm | 50 mm | 2000 mm |
| LKG3707507030B | 37 mm | 75 mm | 2000 mm |
| LKG3710007030B | 37 mm | 100 mm | 2000 mm |
| LKG5003707030B | 50 mm | 35 mm | 2000 mm |
| LKG5005007030B | 50 mm | 50 mm | 2000 mm |
| LKG5007507030B | 50 mm | 75 mm | 2000 mm |
| LKG5010007030B | 50 mm | 100 mm | 2000 mm |
| LKG5012507030B | 50 mm | 125 mm | 2000 mm |
| LKG5014007030B | 50 mm | 140 mm | 2000 mm |
| LKG7505007030B | 75 mm | 50 mm | 2000 mm |
| LKG7507507030B | 75 mm | 75 mm | 2000 mm |
| LKG7510007030B | 75 mm | 100 mm | 2000 mm |
| LKG7512507030B | 100 mm | 50 mm | 2000 mm |

| Cover | | |
|--------------|--------|---------|
| Reference | Width | Length |
| LK3702527030 | 25 mm | 2000 mm |
| LK3703727030 | 35 mm | 2000 mm |
| LK3705027030 | 50 mm | 2000 mm |
| LK3707527030 | 75 mm | 2000 mm |
| LK3710027030 | 100 mm | 2000 mm |
| LK5012527030 | 125 mm | 2000 mm |
| LK5014027030 | 140 mm | 2000 mm |

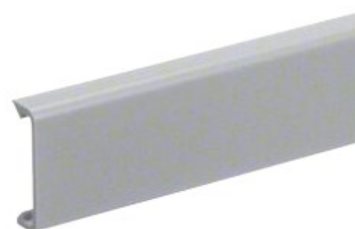


Fig.2: LK3707527030

| End Plate | |
|--------------|----------------|
| Reference | matches to |
| LK3702547030 | LKG3702507030B |
| LK3703747030 | LKG3703707030B |
| LK3705047030 | LKG3705007030B |
| LK3707547030 | LKG3707507030B |
| LK5003747030 | LKG5003707030B |
| LK5005047030 | LKG5005007030B |
| LK5007547030 | LKG5007507030B |
| LK5010047030 | LKG5010007030B |
| LK5012547030 | LKG5012507030B |
| LK5014047030 | LKG5014007030B |
| LK7505047030 | LKG7505007030B |
| LK7507547030 | LKG7507507030B |
| LK7510047030 | LKG7510007030B |
| LK7512547030 | LKG7512507030B |


| Wire Retainer | |
|---------------|----------------|
| Reference | matches to |
| LK370503 | LKG3705007030B |
| LK370753 | LKG3707507030B |
| LK500503 | LKG5005007030B |
| LK500753 | LKG5007507030B |
| LK501003 | LKG5010007030B |
| LK501253 | LKG5012507030B |
| LK501403 | LKG5014007030B |
| LK750503 | LKG7505007030B |
| LK750753 | LKG7507507030B |
| LK751003 | LKG7510007030B |
| LK751253 | LKG7512507030B |




Fig.3: LK750753



 Fig.4: LK7507547030




for duct width 25 mm

 


for duct width 37 mm




for duct width 50 mm

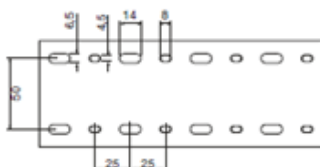


for duct width 75 mm

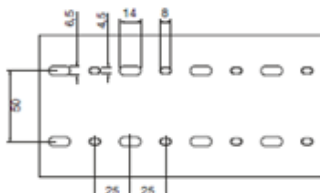


for duct width 100 mm

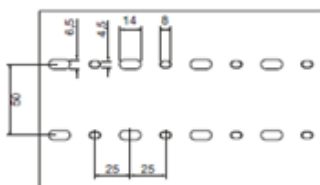

for duct width 125 mm

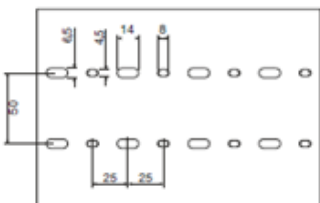


for duct width 140 mm

 

for duct height 25 mm



for duct height 50 mm

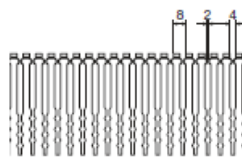

for duct height 75 mm

