
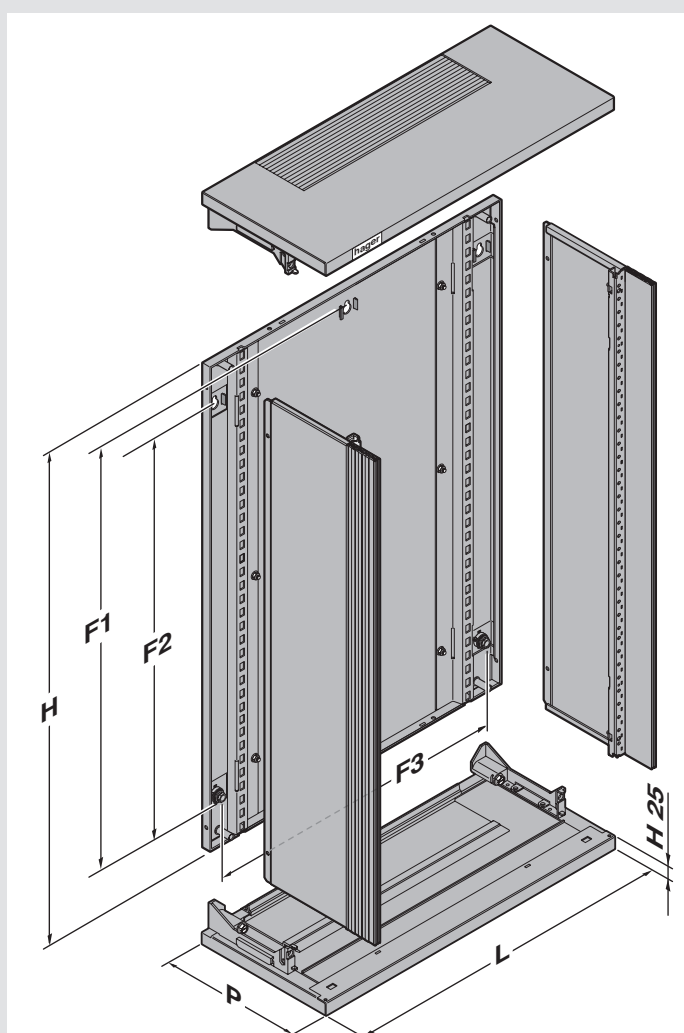
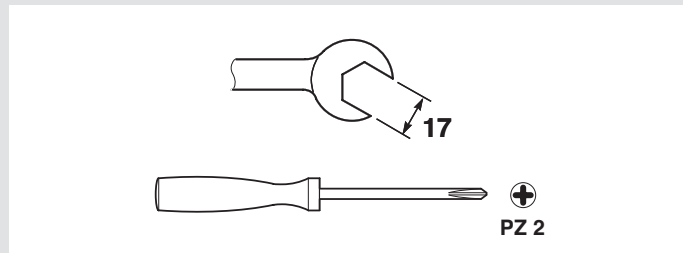
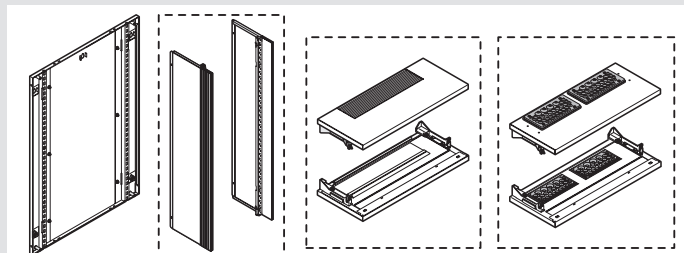
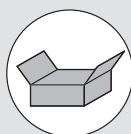










Quadro 4






- (FR) Corps d'armoires
- (ES) Cuerpos de los armarios
- (PT) Corpos de armarios
- (GR) Κύριο σώμα των ερμαρίων

- Notice d'instructions
- User instructions
- Bedienungsanleitung
- Οδηγίες χρήσεως





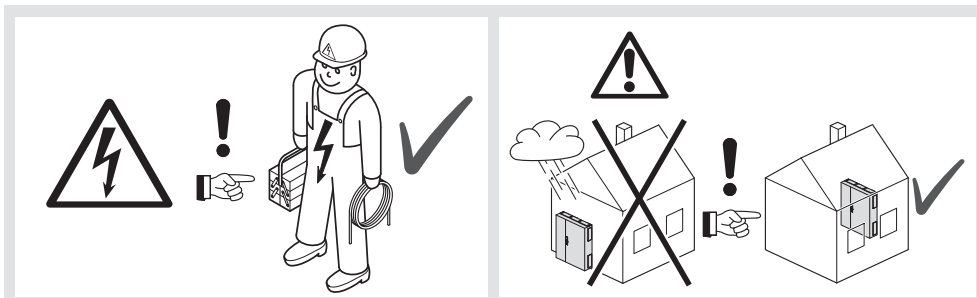





	H	L	P	F1	F2	F3
FC110	450	370	267	305	270	315
FC210	450	620	267	305	270	565
FC111	600	370	267	455	420	315
FC211	600	620	267	455	420	565
FC112	750	370	267	605	570	315
FC212	750	620	267	605	570	565
FC113	900	370	267	755	720	315
FC213	900	620	267	755	720	565
FC114	1050	370	267	905	870	315
FC214	1050	620	267	905	870	565
FC115	1200	370	267	1055	1020	315
FC215	1200	620	267	1055	1020	565
FC116	1350	370	267	1205	1170	315
FC216	1350	620	267	1205	1170	565

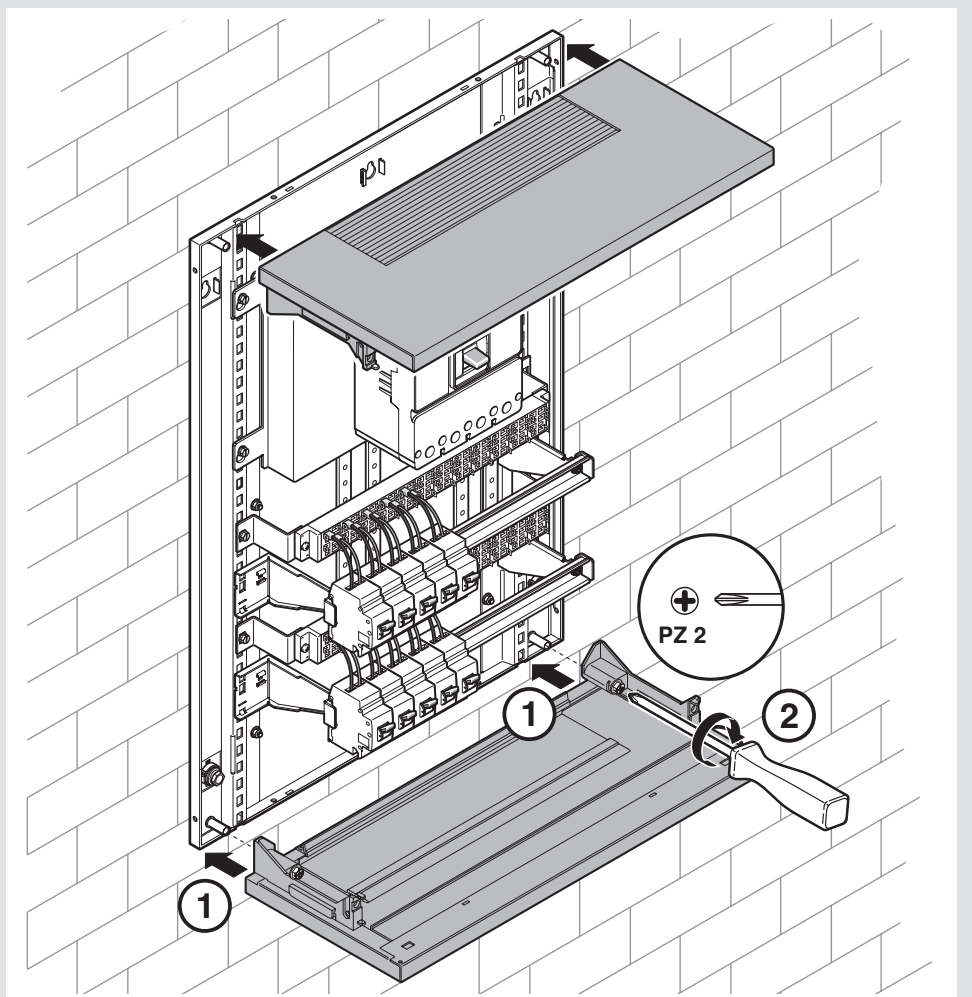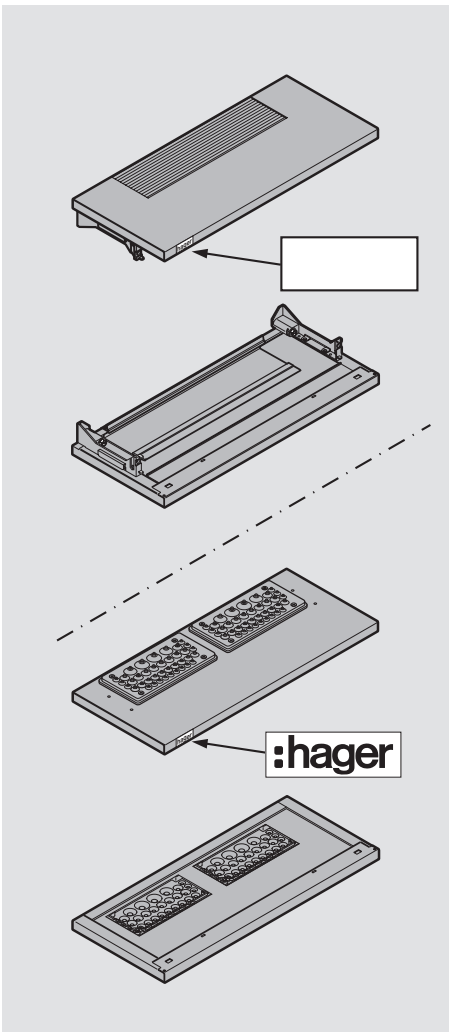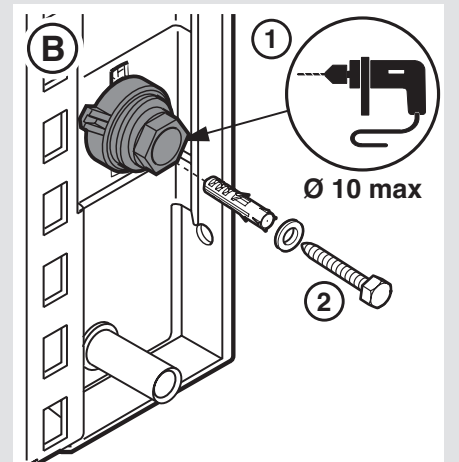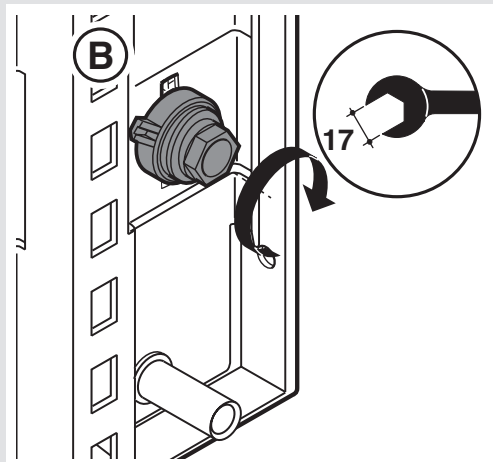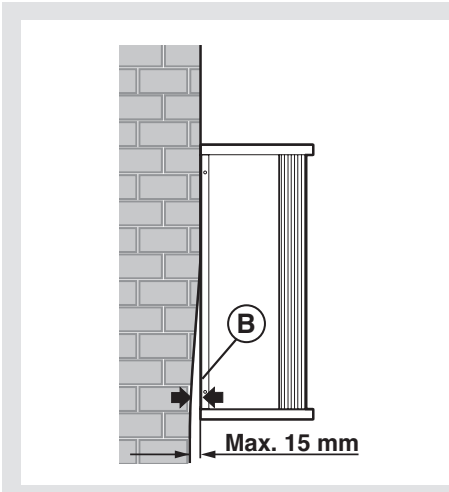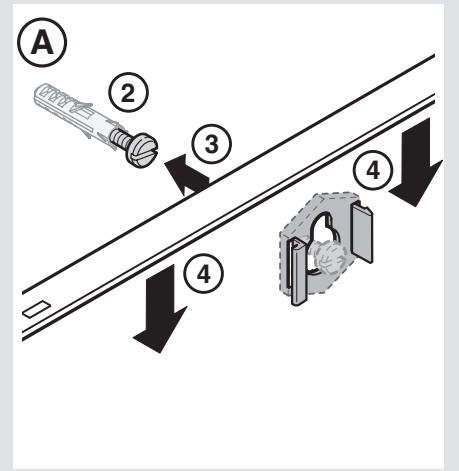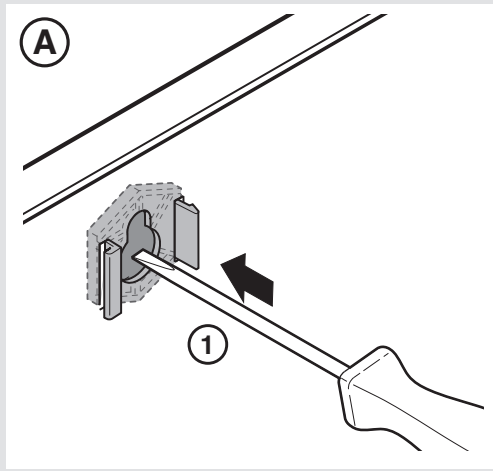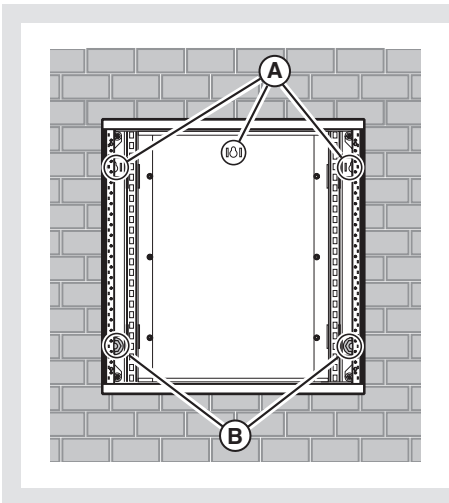


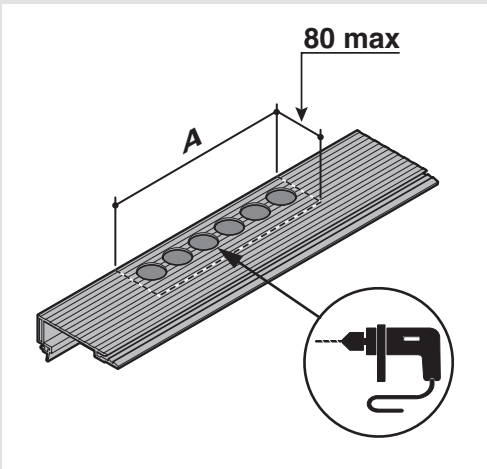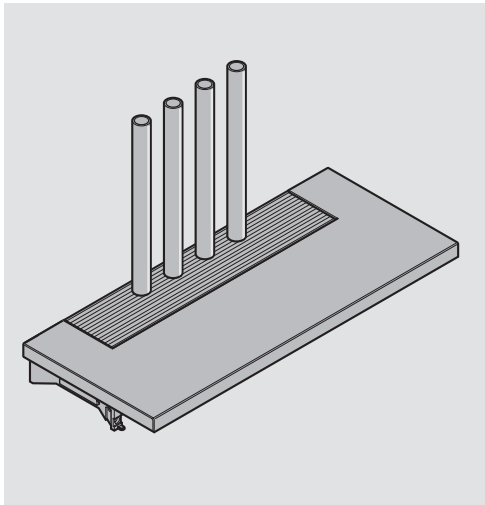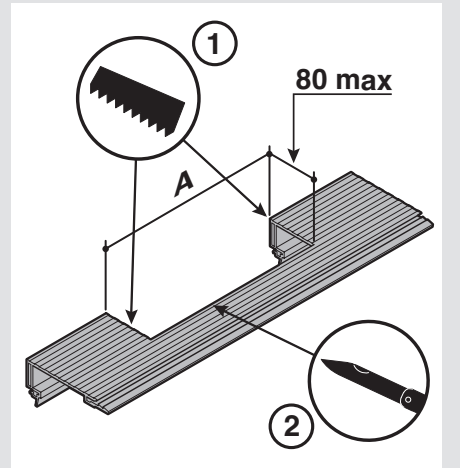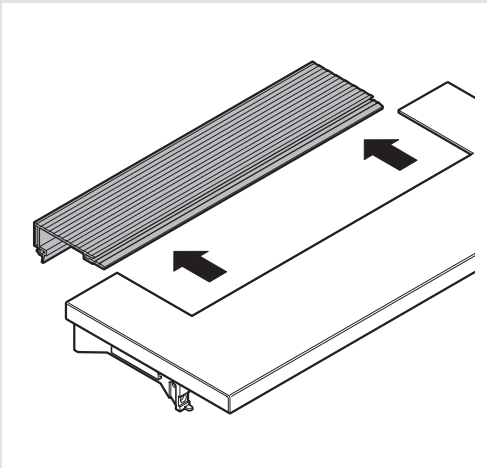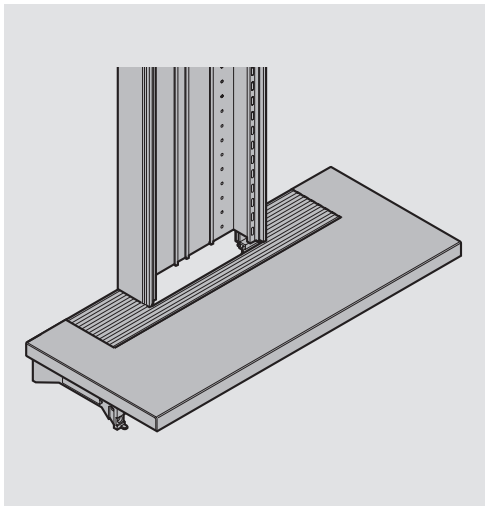

	A	A
A max	150	400

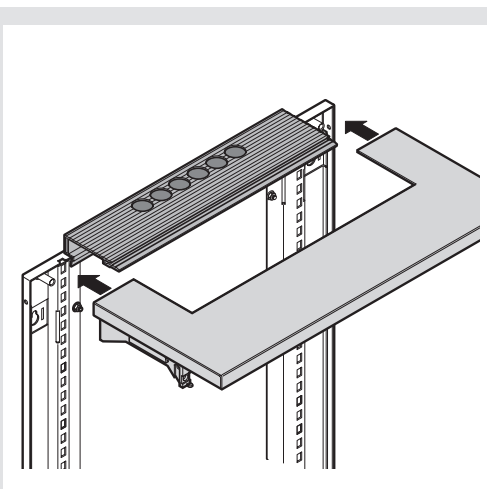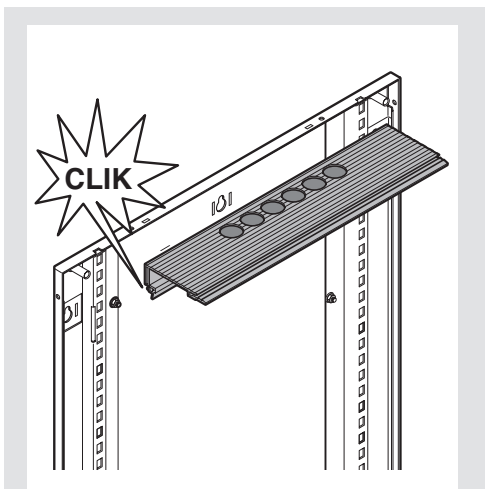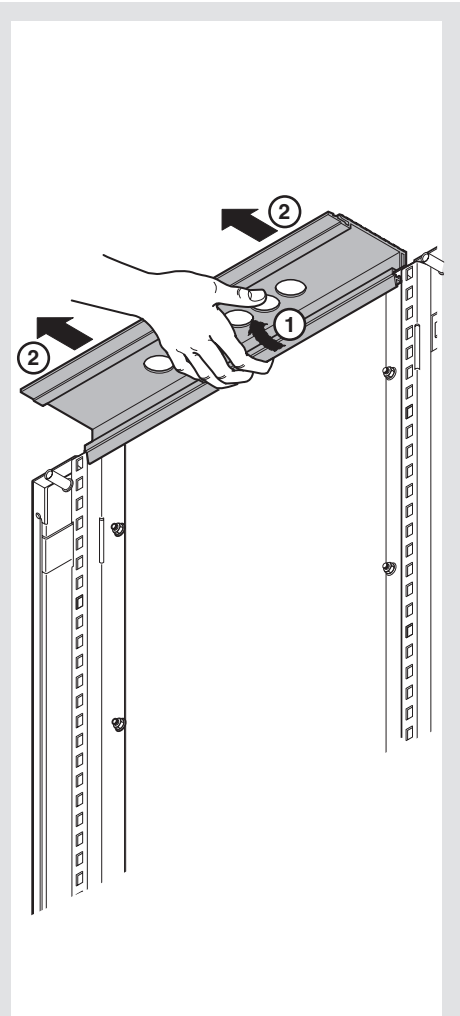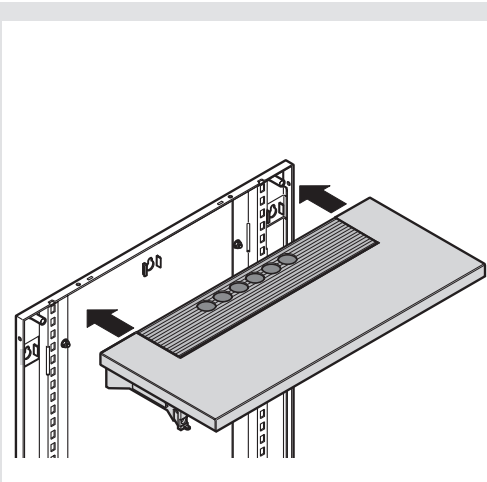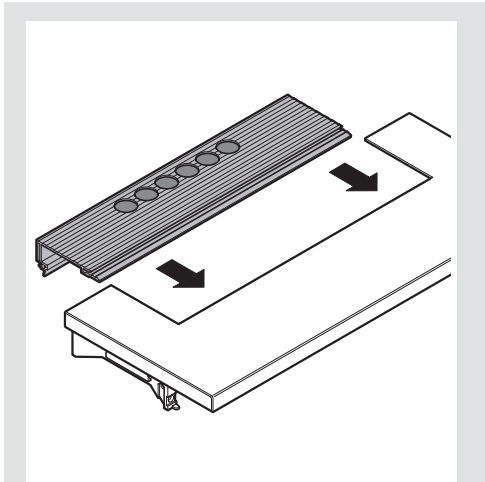


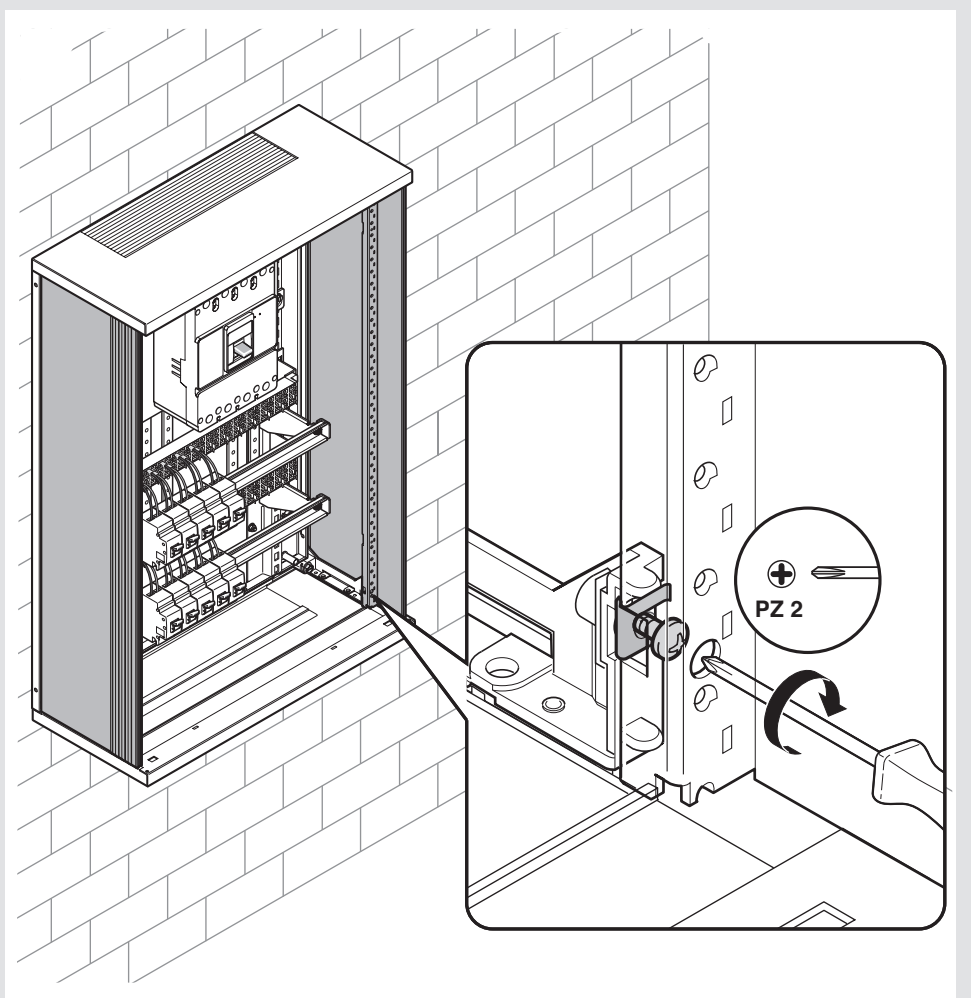
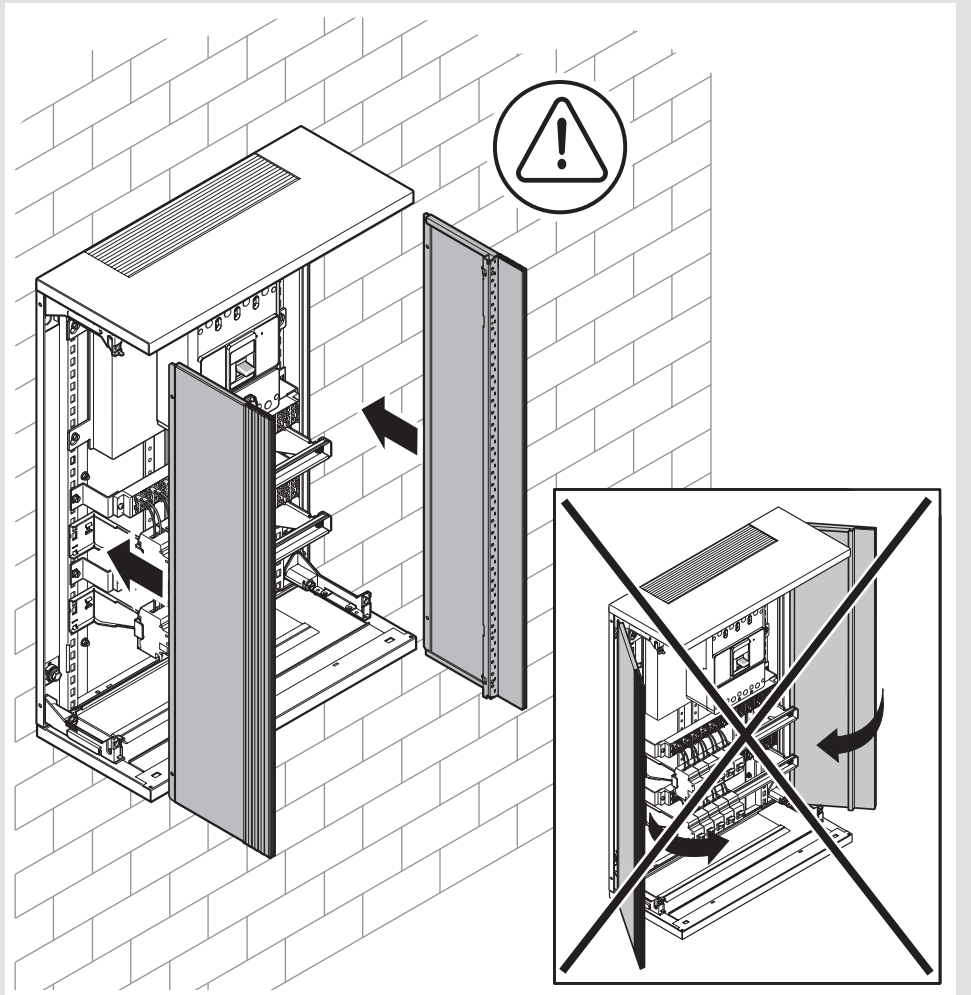
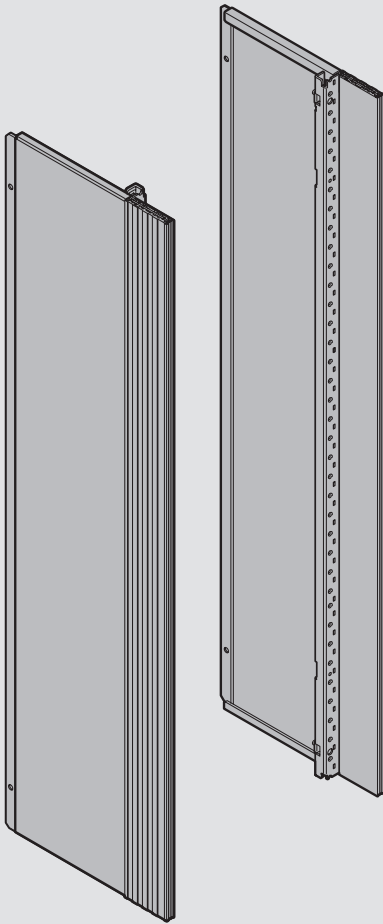


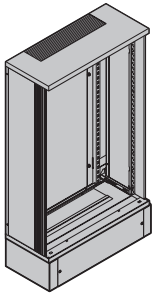






Quadro 4









- (FR) Corps d'armoires
- (ES) Cuerpos de los armarios
- (PT) Corpos de armarios
- (GR) Κύριο σώμα των ερμαρίων

- Notice d'instructions
- User instructions
- Bedienungsanleitung
- Οδηγίες χρήσεως

 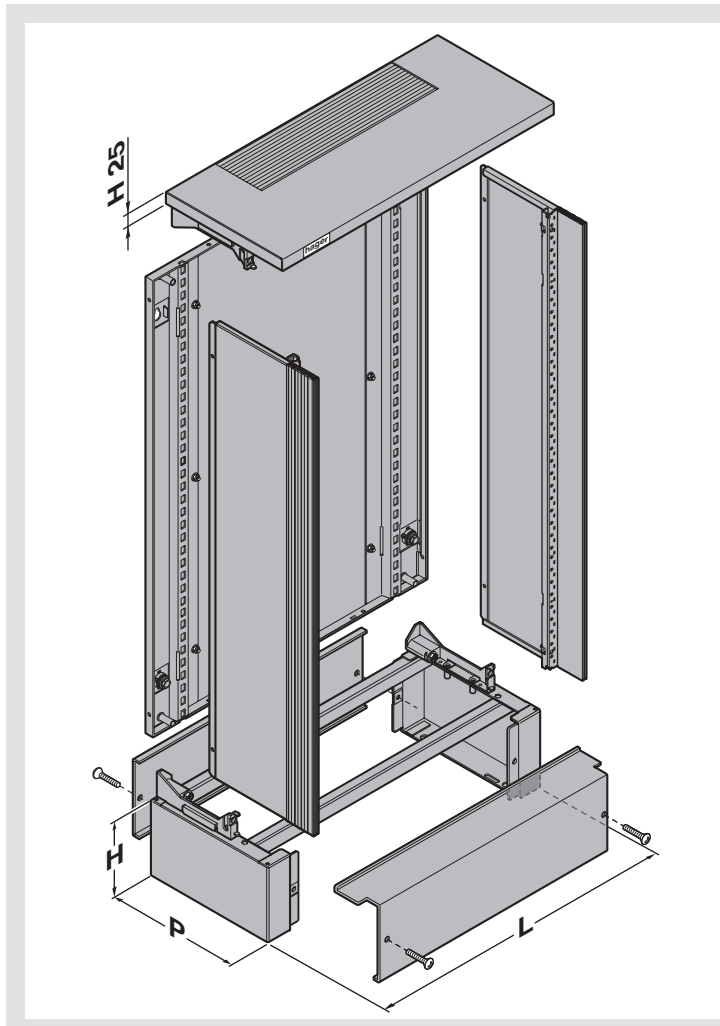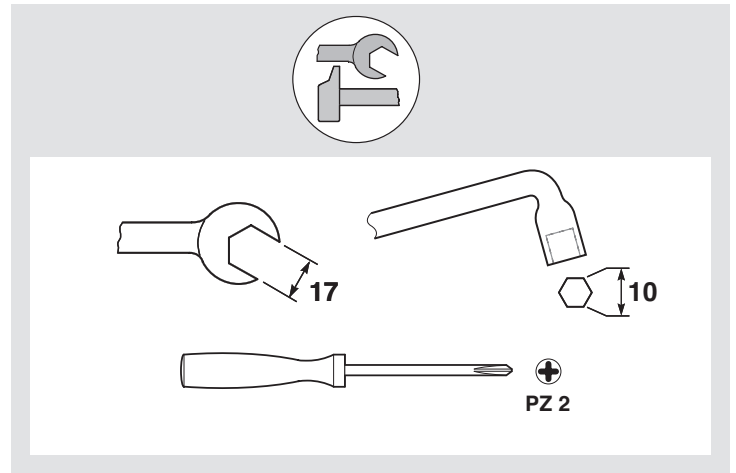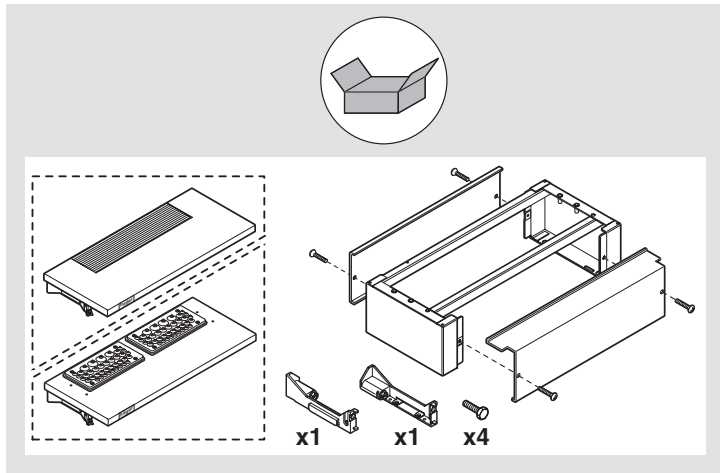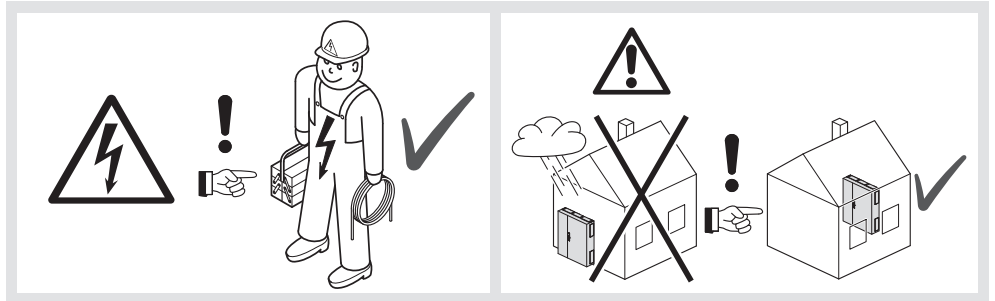


	L	H	P
FC445	370	150	267
FC446	370	150	267
FC455	620	150	267
FC456	620	150	267

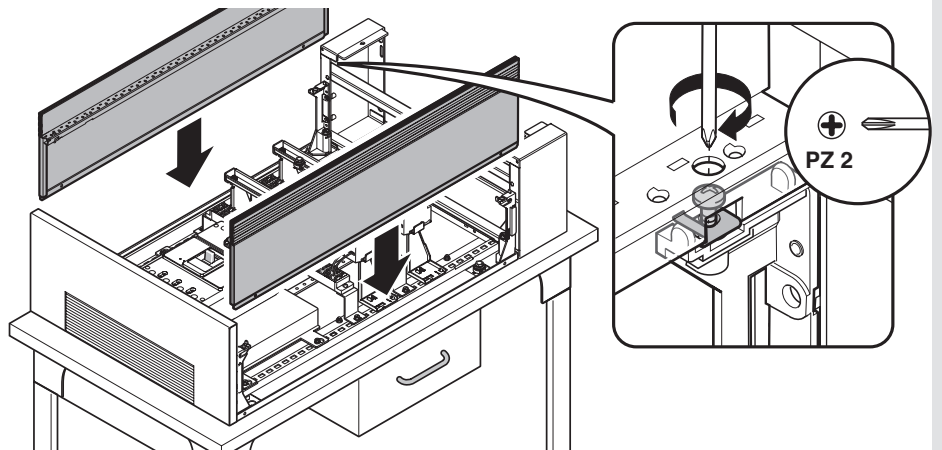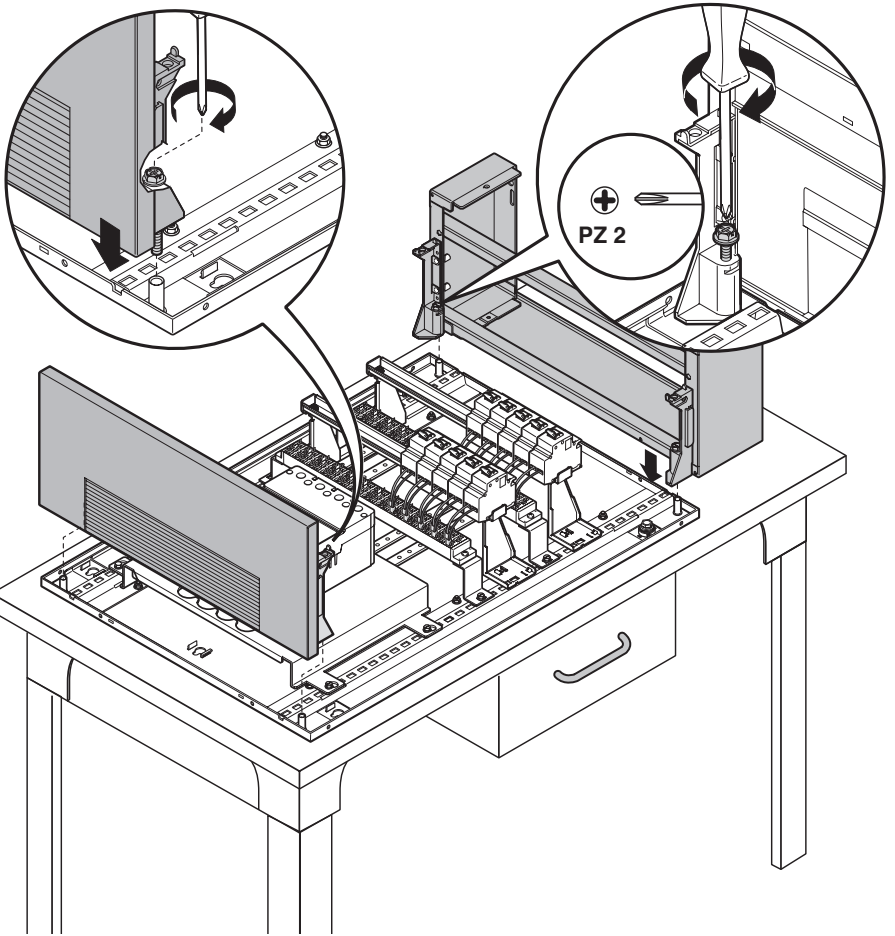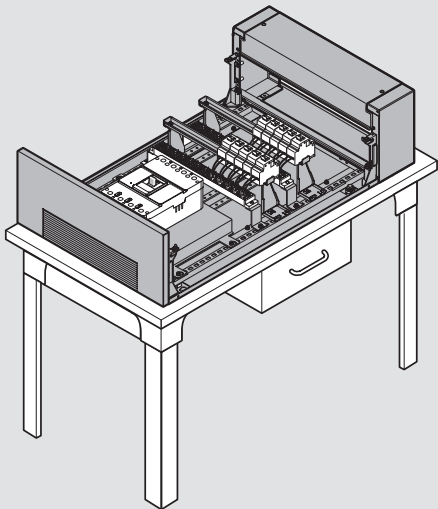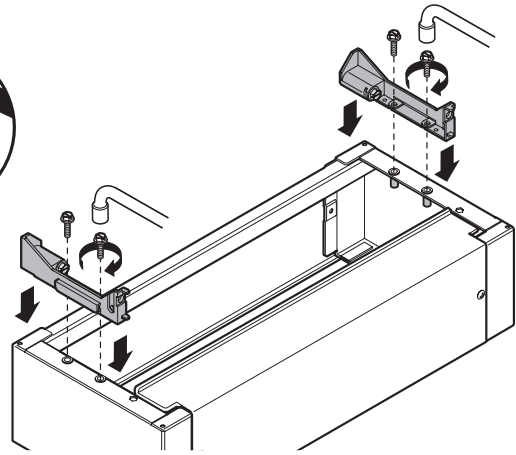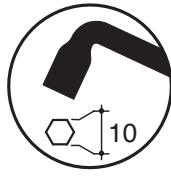

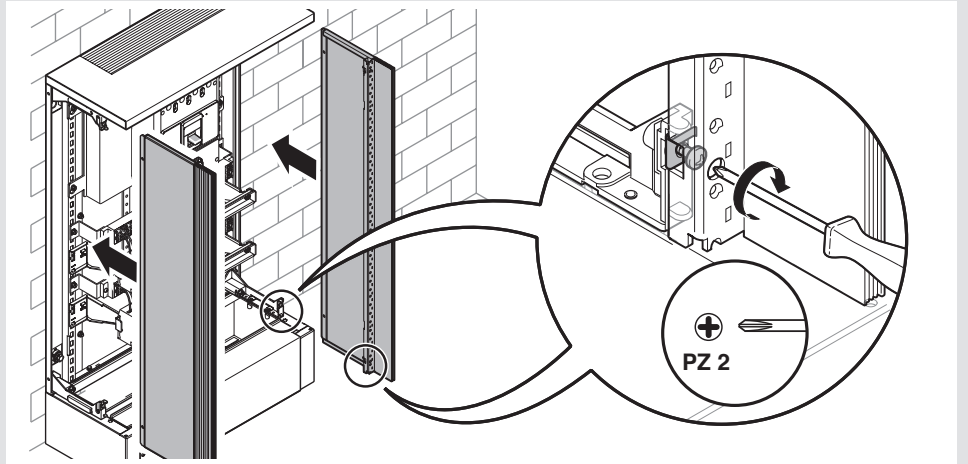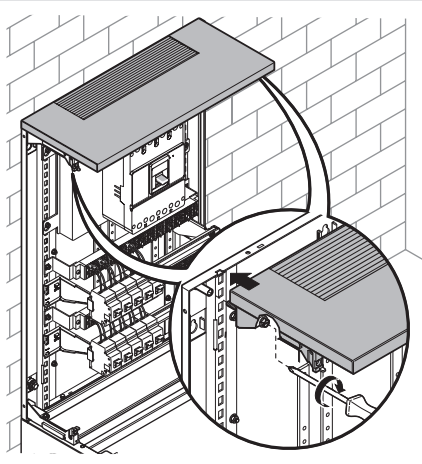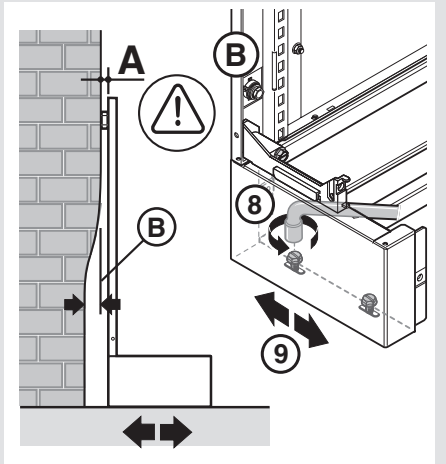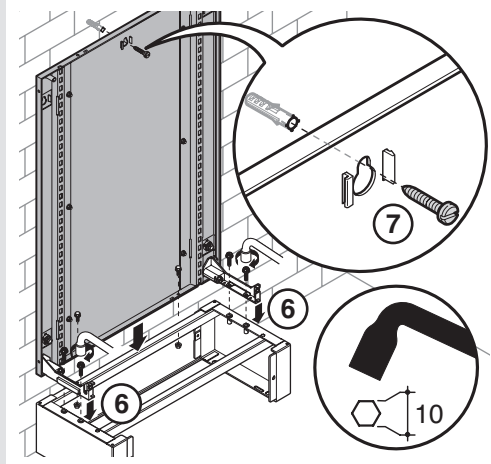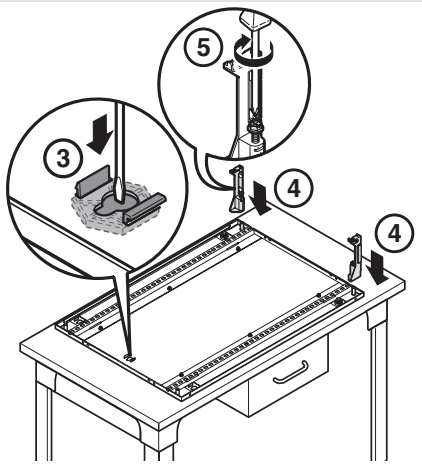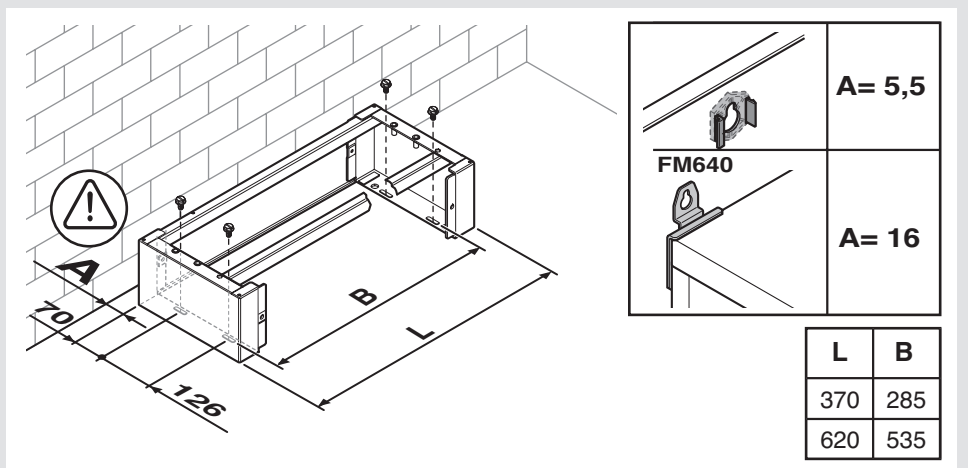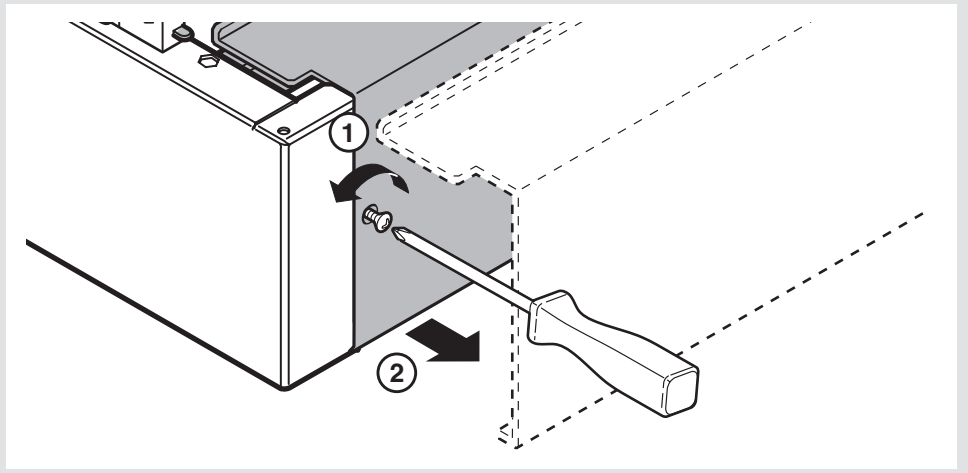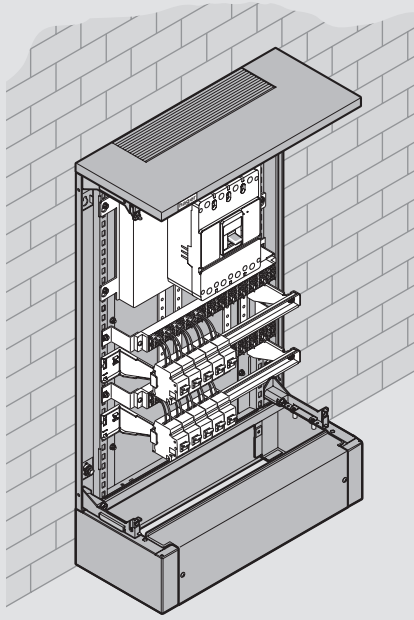






6F 5211.c










- (FR) Corps d'armoires
- (ES) Cuerpos de los armarios
- (PT) Corpos de armarios
- (GR) Κύριο σώμα των ερμαριών


- Notice d'instructions
- User instructions
- Bedienungsanleitung
- Οδηγίες χρήσεως

Quadro 4

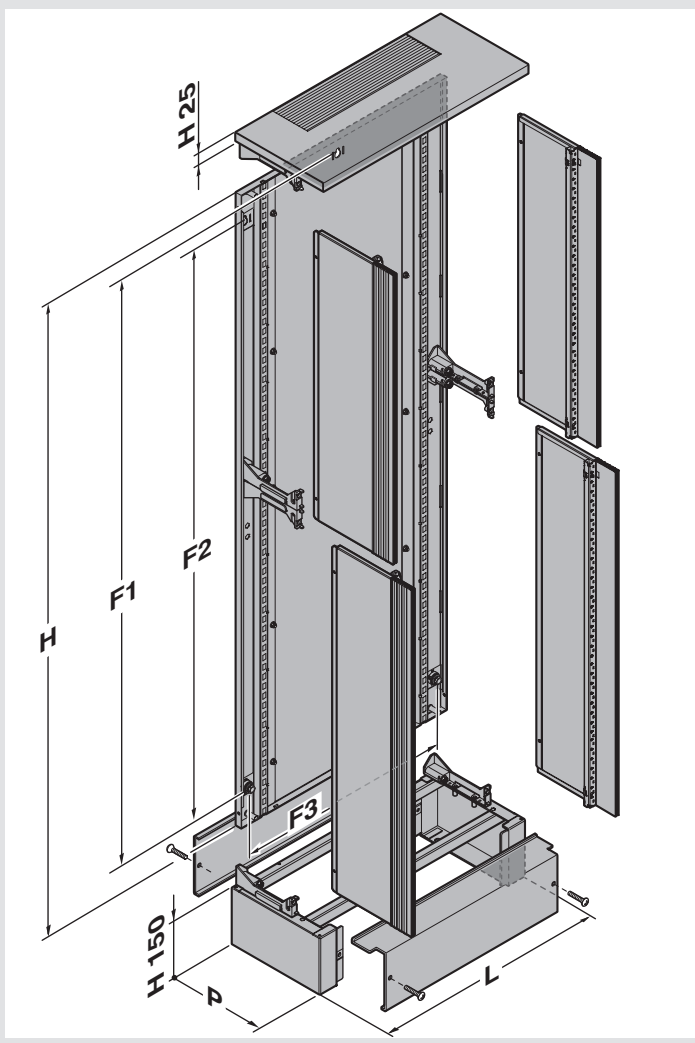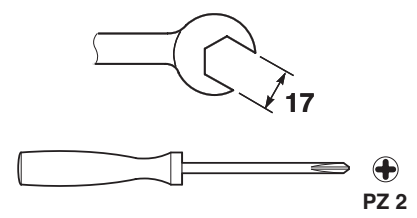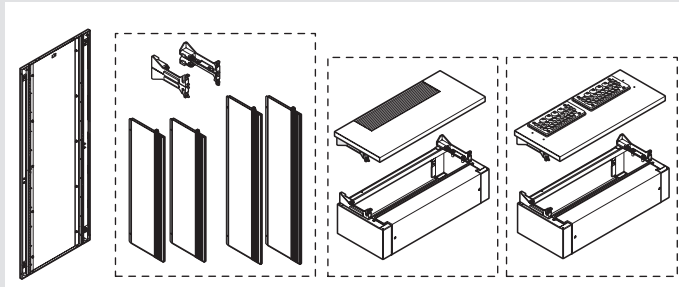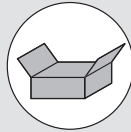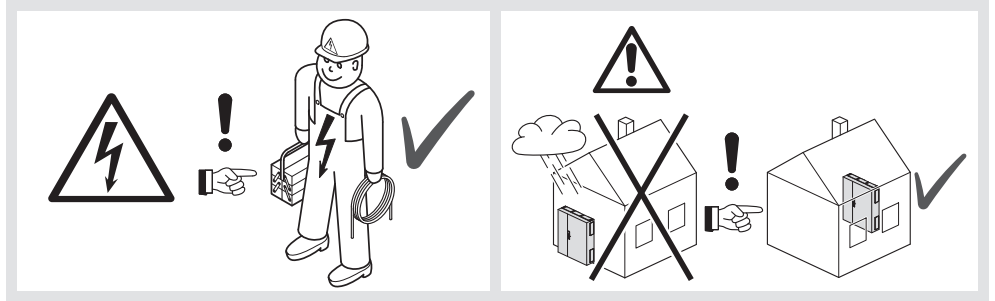

	H	L	P	F1	F2	F3
FC118	1650	370	267	1505	1470	315
FC218	1650	620	267	1505	1470	315
FC119	1800	370	267	1655	1620	565
FC219	1800	620	267	1655	1620	565


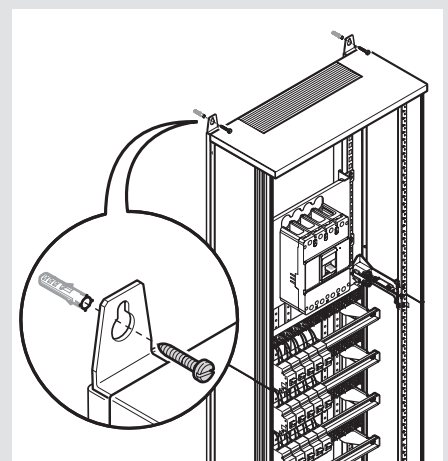
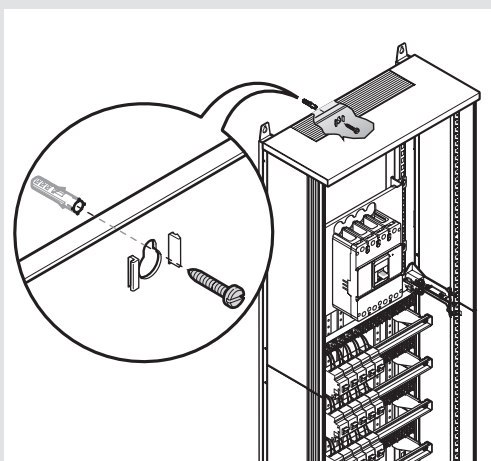
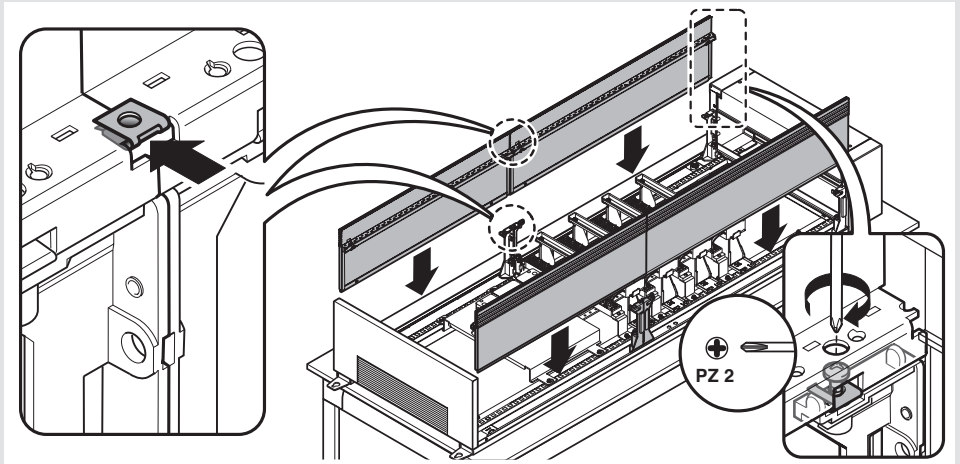
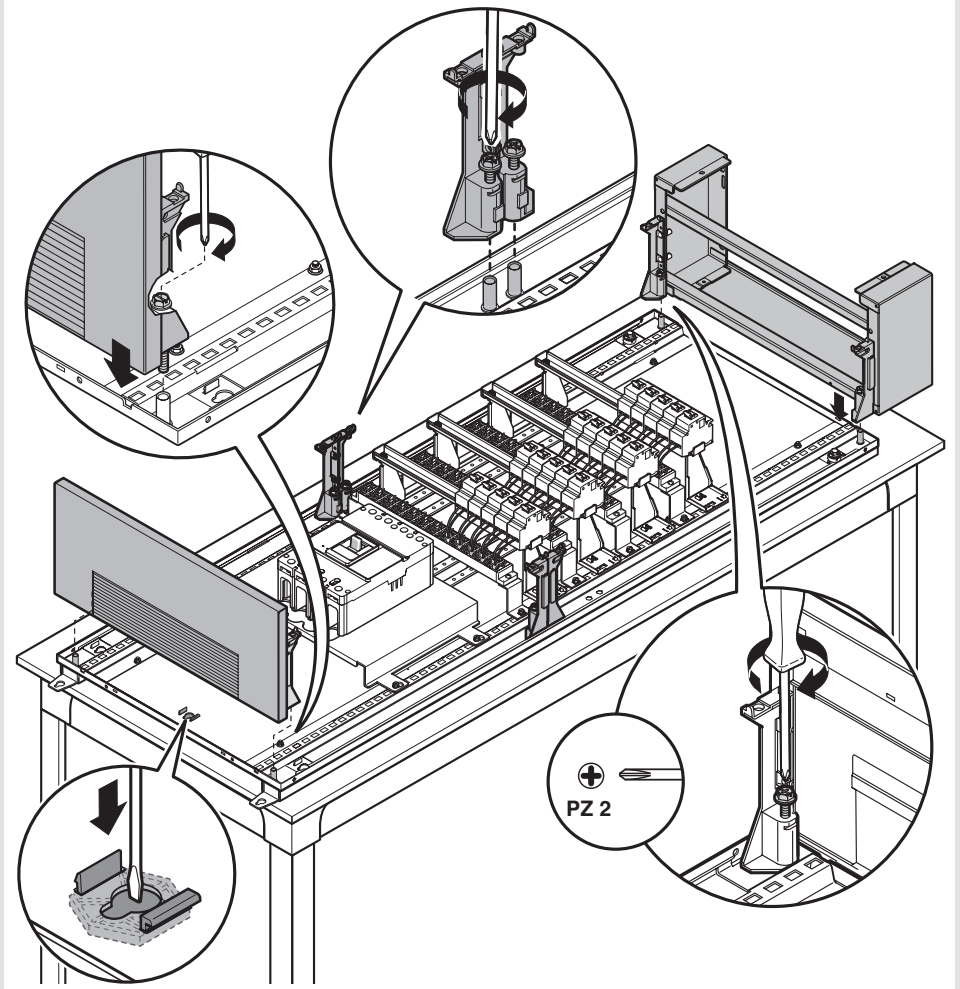
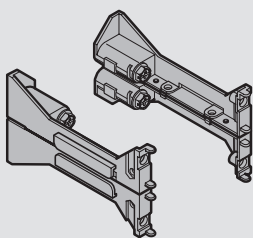
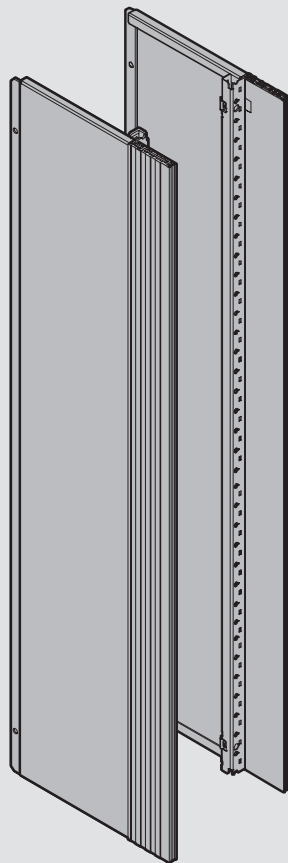
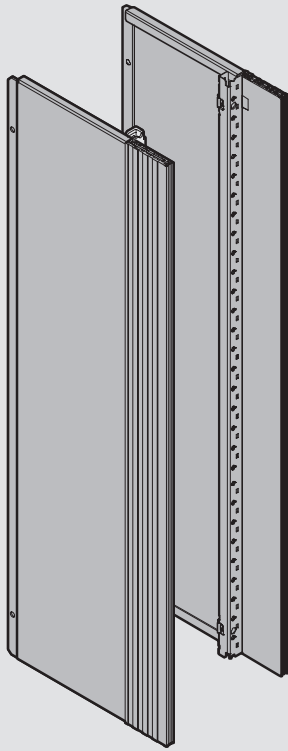


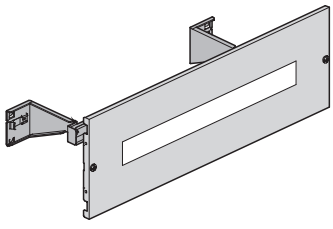


- Ⓡ FR Kits d'équipement
- Ⓡ ES Juegos de equipamiento
- Ⓡ PT Kits de equipamento
- Ⓡ GR Εξαρτήματα εξοπλισμού

- Notice d'instructions
- User instructions
- Bedienungsanleitung
- Οδηγίες χρήσεως

Quadro 4

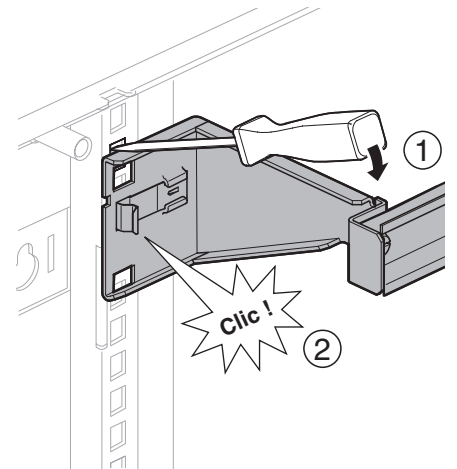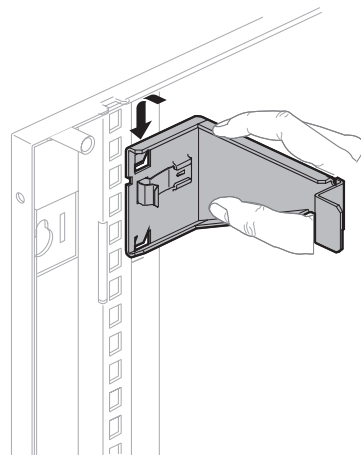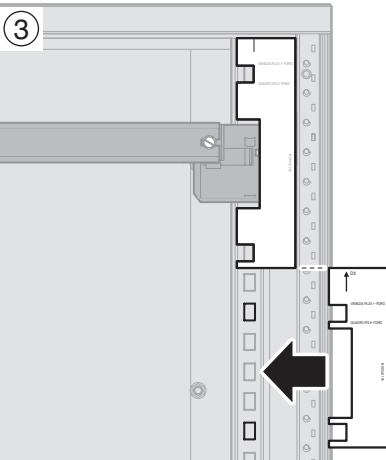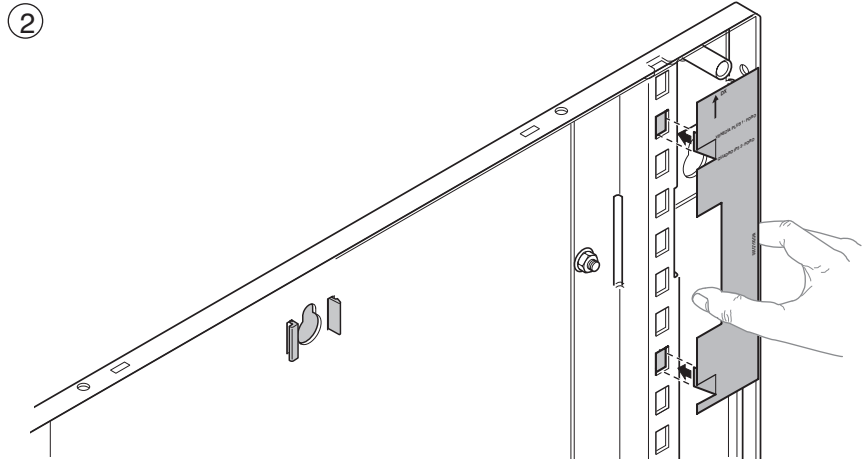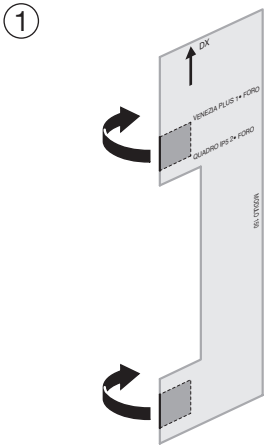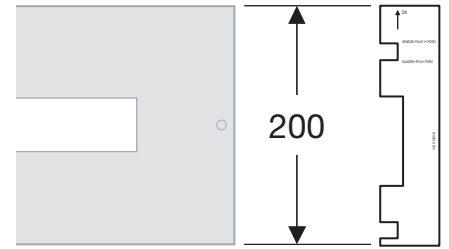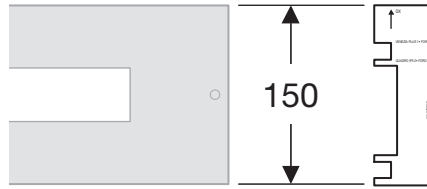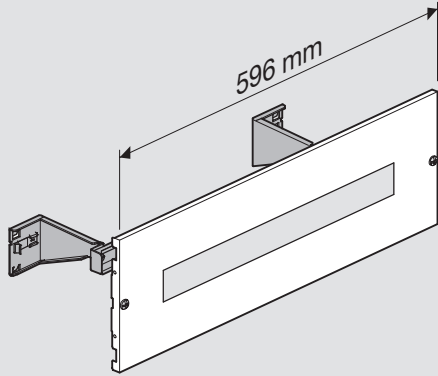

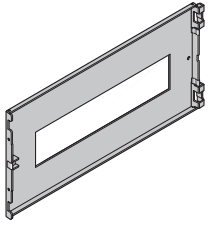

- Ⓡ Kit charnières pour plastrons
- Ⓢ Juego bisagras para tapas
- Ⓟ Kit de dobradiças para tampas
- Ⓜ Εξαρτήματα μεντεσεδων για τις μετώπες

 

Notice d'instructions

User instructions

Bedienungsanleitung

Οδηγίες χρήσεως

Quadro 4

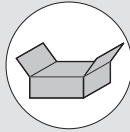

x2



x2



x2








x2

UC268




⊕
PZ 2

 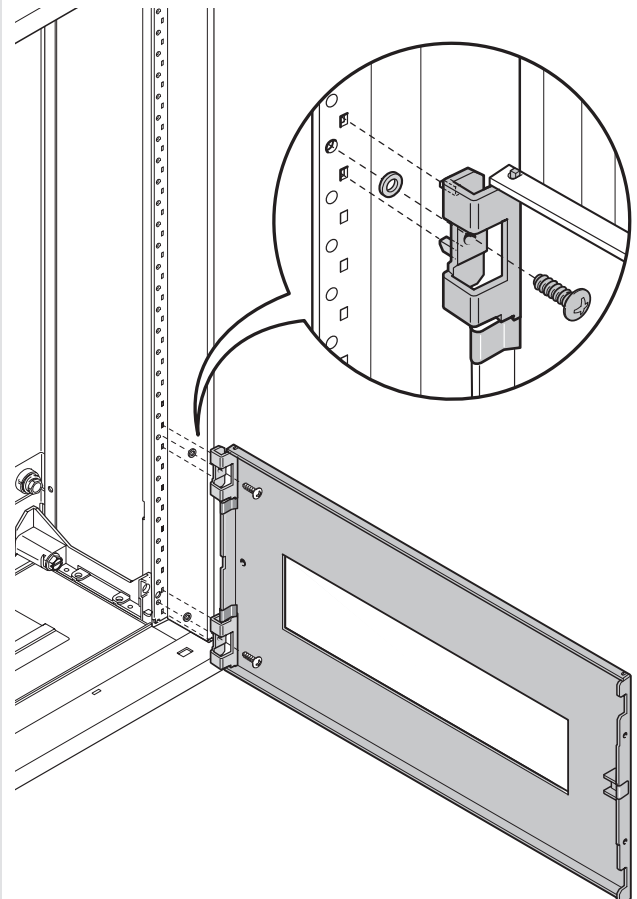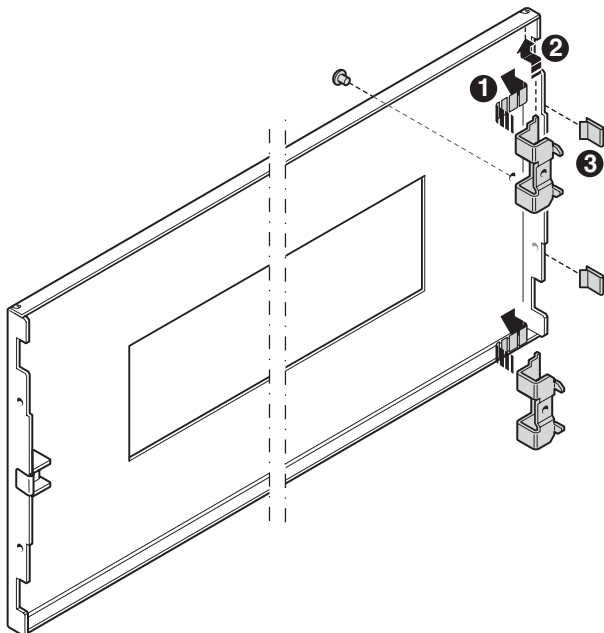


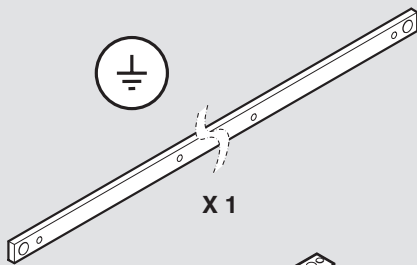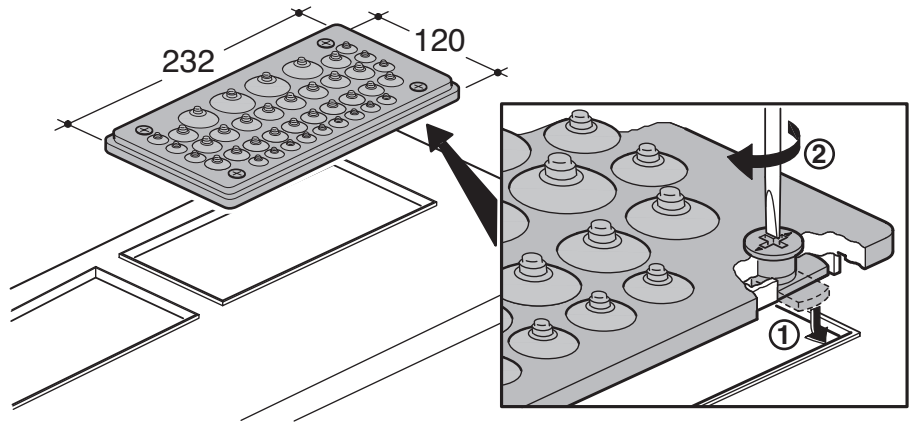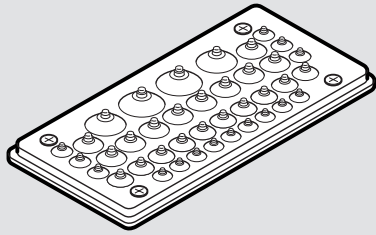

X 1

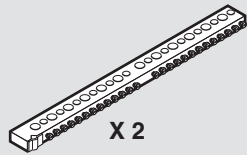

X 2



X 2



X 2



X 2

 




X 2

 


X 4

UC972

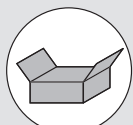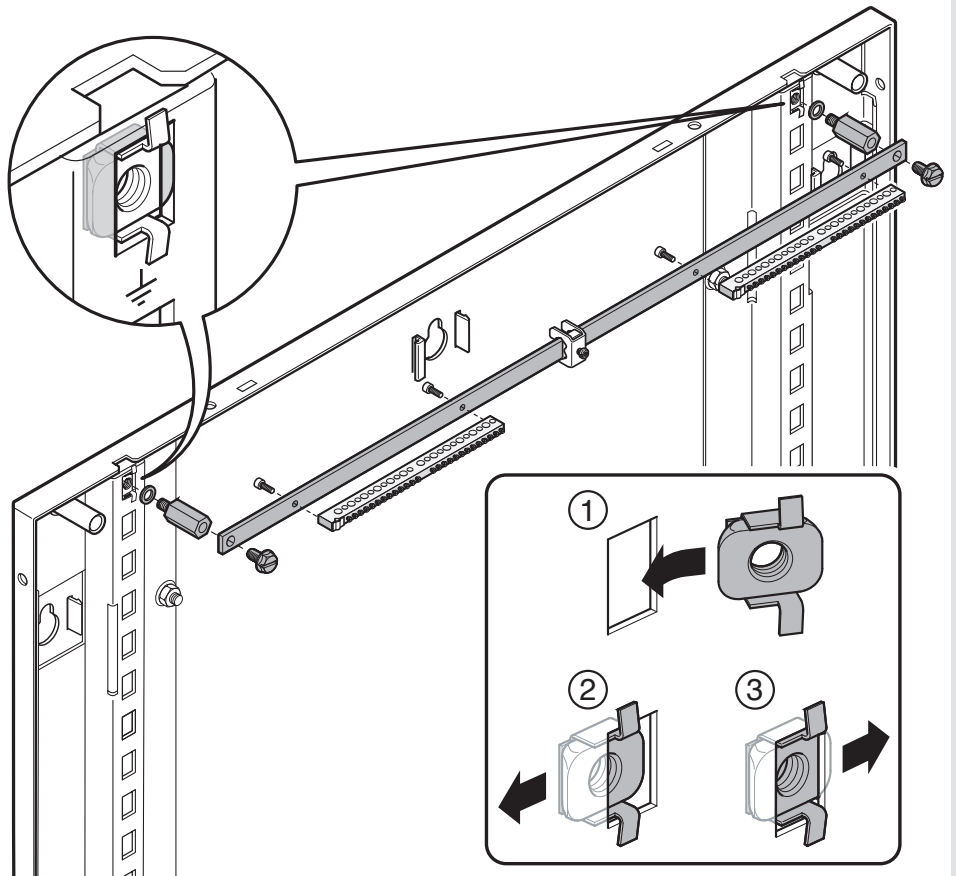

X 2





X 2





X 2




FM640


 


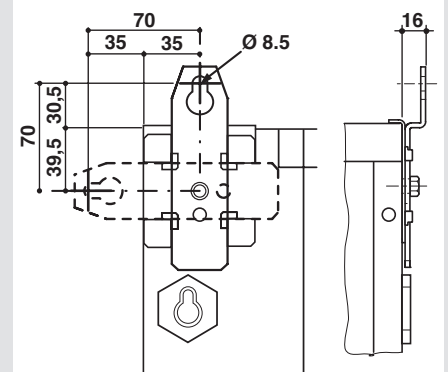
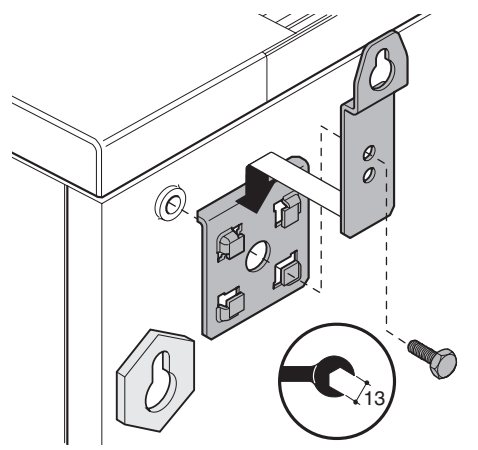

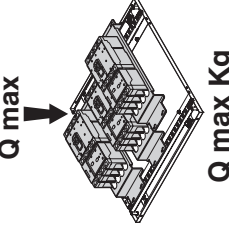
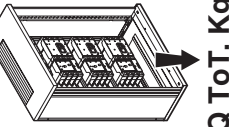




 
 


 

 


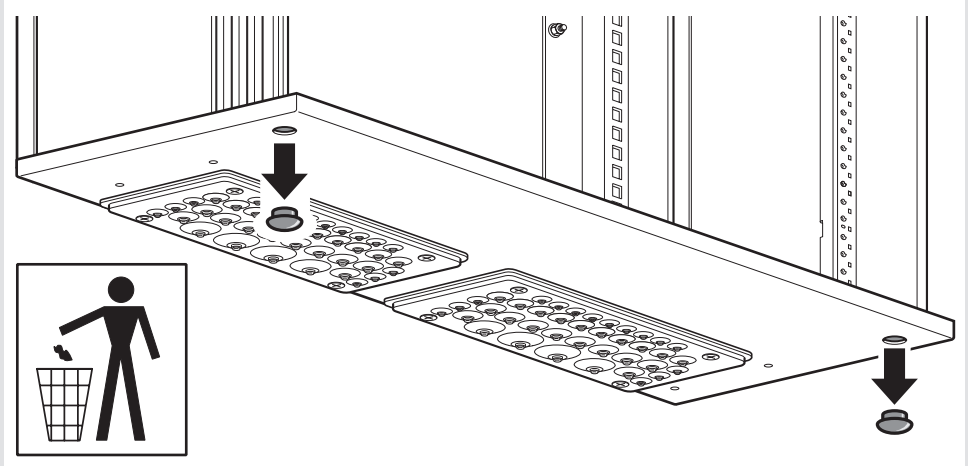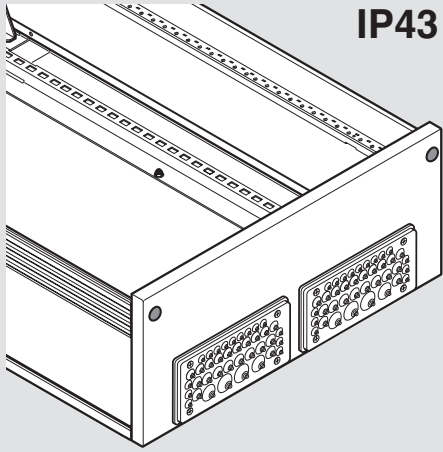
 

 


 

 

 
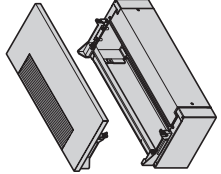
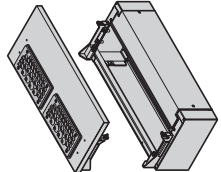
 

 


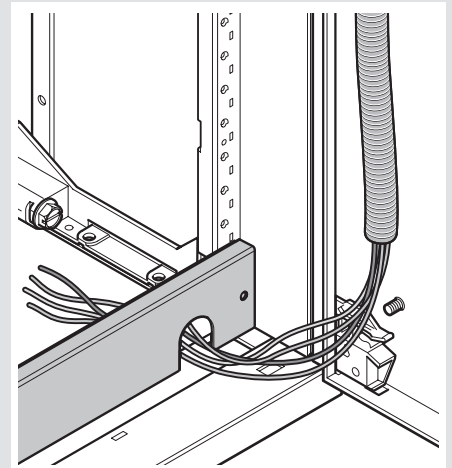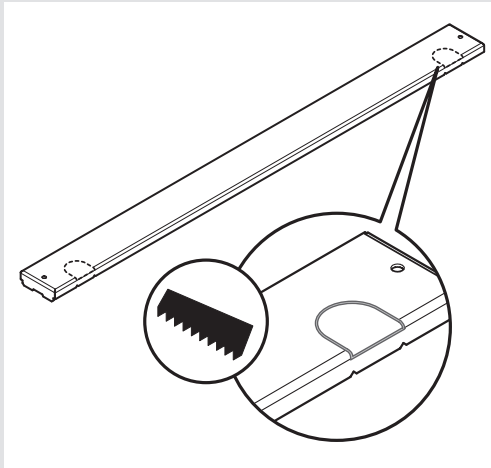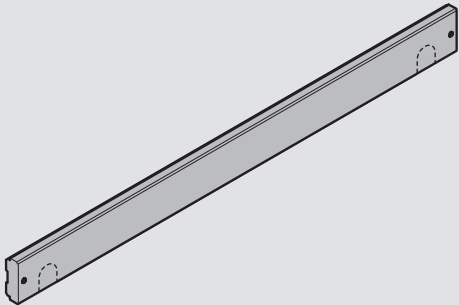
 

 


 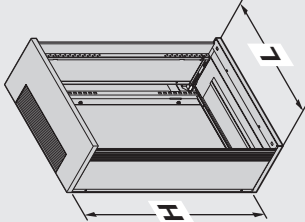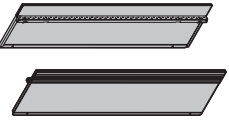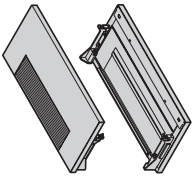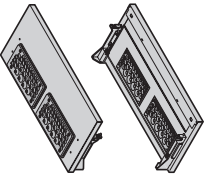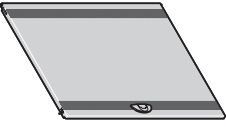

 

 
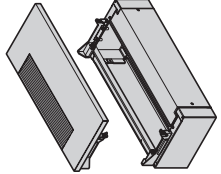
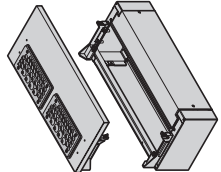
 

 


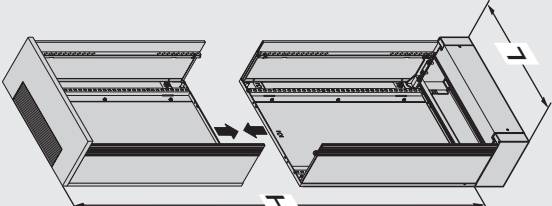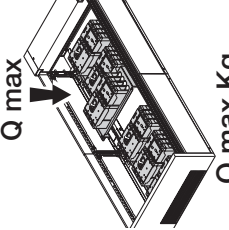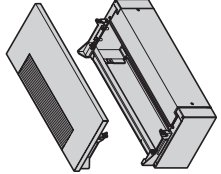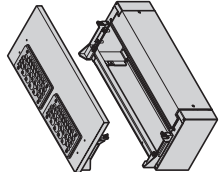
 

 


 

 

 
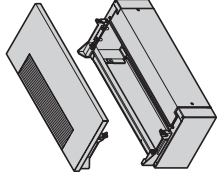
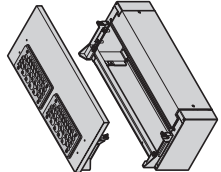
 

 



 

 


 

 

 
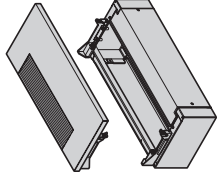
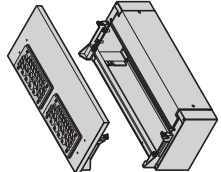
 

 



 

 


 

 

 
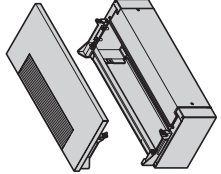
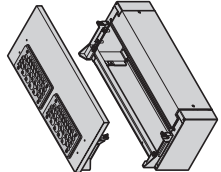
 

 



 

 


 

 

 
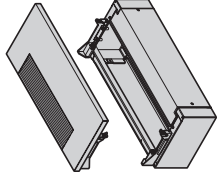
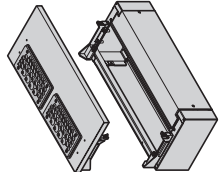
 

 



 

 


 

 

 
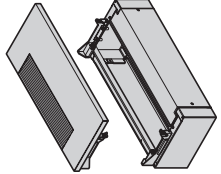
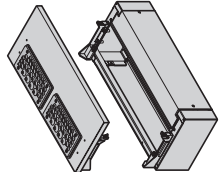
 

 



 

 


 

 

IP43













IP30



											
H	L									Q max Kg	Q ToT. Kg
450	370	FC110	FC010	FC415	FC416	FC310	//	21	33		
600	370	FC111	FC011	FC415	FC416	FC311	//	21	35		
750	370	FC112	FC012	FC415	FC416	FC312	//	26	43		
900	370	FC113	FC013	FC415	FC416	FC313	//	32	52		
1050	370	FC114	FC014	FC415	FC416	FC314	//	38	60		
1200	370	FC115	FC015	FC415	FC416	FC315	//	44	69		
1350	370	FC116	FC016	FC415	FC416	FC316	//	50	78		
450	620	FC210	FC010	FC425	FC426	FC330	FC340	42	59		
600	620	FC211	FC011	FC425	FC426	FC331	FC341	42	62		
750	620	FC212	FC012	FC425	FC426	FC332	FC342	53	77		
900	620	FC213	FC013	FC425	FC426	FC333	FC343	65	92		
1050	620	FC214	FC014	FC425	FC426	FC334	FC344	77	107		
1200	620	FC215	FC015	FC425	FC426	FC335	FC345	88	121		
1350	620	FC216	FC016	FC425	FC426	FC336	FC346	100	137		

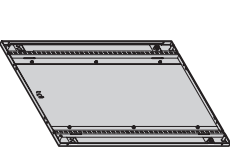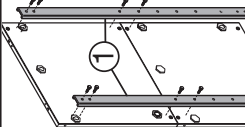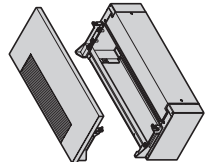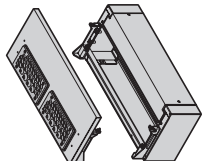													
H	L										Q max Kg	Q Tot. Kg	
1500	370		FC110+FC114		FC445		FC446		FC230		FC317		67
			FC112+FC112		FC445		FC446		FC230		FC317		67
			FC111+FC113		FC445		FC446		FC230		FC317		67
1650	370		FC110+FC115		FC445		FC446		FC230		FC318		73
			FC111+FC114		FC445		FC446		FC230		FC318		73
			FC112+FC113		FC445		FC446		FC230		FC318		73
1800	370		FC110+FC116		FC445		FC446		FC230		FC319		80
			FC111+FC115		FC445		FC446		FC230		FC319		80
			FC112+FC114		FC445		FC446		FC230		FC319		80
1500	620		FC210+FC214		FC455		FC456		FC230		FC337		112
			FC212+FC212		FC455		FC456		FC230		FC337		112
			FC211+FC213		FC455		FC456		FC230		FC337		112
1650	620		FC210+FC215		FC455		FC456		FC230		FC338		122
			FC211+FC214		FC455		FC456		FC230		FC338		122
			FC212+FC213		FC455		FC456		FC230		FC338		122
1800	620		FC210+FC216		FC455		FC456		FC230		FC339		134
			FC211+FC215		FC455		FC456		FC230		FC339		134
			FC212+FC214		FC455		FC456		FC230		FC339		134
1650	370		FC118		FC445		FC446		FC230		FC318		82
			FC119		FC445		FC446		FC230		FC319		90
			FC119		FC445		FC446		FC230		FC319		90
1650	620		FC218		FC455		FC456		FC230		FC338		140
			FC219		FC455		FC456		FC230		FC339		154
			FC219		FC455		FC456		FC230		FC339		154

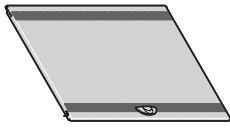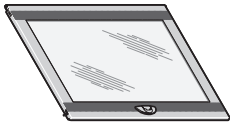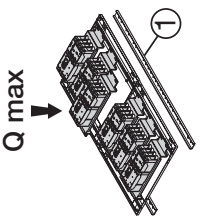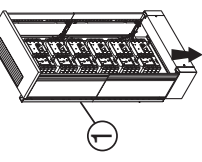H		L											
H	L	FC110+FC114 FC112+FC112 FC111+FC113	FC191	FC010+FC014 FC012+FC012 FC011+FC013	FC445	FC446	FC230	FC317	FC317	FC317	FC317	Q max Kg	Q Tot. Kg
1500	370											54	98
1650	370											60	107
1800	370											65	115
1500	620	FC210+FC214 FC212+FC212 FC211+FC213	FC191	FC010+FC014 FC012+FC012 FC011+FC013	FC455	FC456	FC230	FC337	FC230	FC337	FC347	107	163
1650	620											119	179
1800	620											130	194
1650	370	FC118	FC191	FC012+FC013	FC445	FC446	FC230	FC318	FC230	FC318	FC318	60	107
1800	370	FC119	FC191	FC013+FC013	FC445	FC446	FC230	FC319	FC230	FC319	FC319	65	115
1650	620	FC218	FC191	FC012+FC013	FC455	FC456	FC230	FC338	FC230	FC338	FC348	119	179
1800	620	FC219	FC191	FC013+FC013	FC455	FC456	FC230	FC339	FC230	FC339	FC349	130	194

