
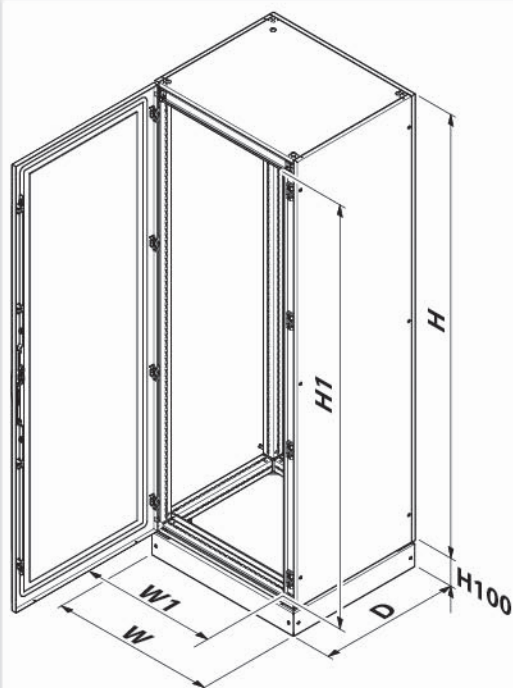



- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu


- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Mont žas instrukcija
- (PL) Instrukcja monta owa
- (RO) Intruțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar

## quadro evo enclosure internal system

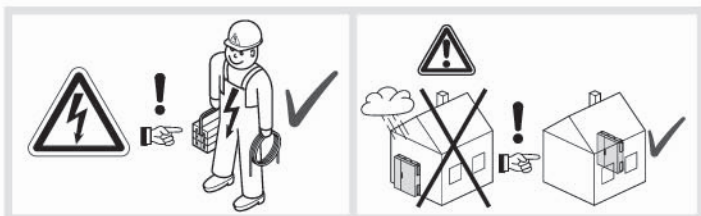



W	W1	H	H1	D
450	350			400
700	600	1900	1800	600
900	800	2100	2000	600
1000	600			800

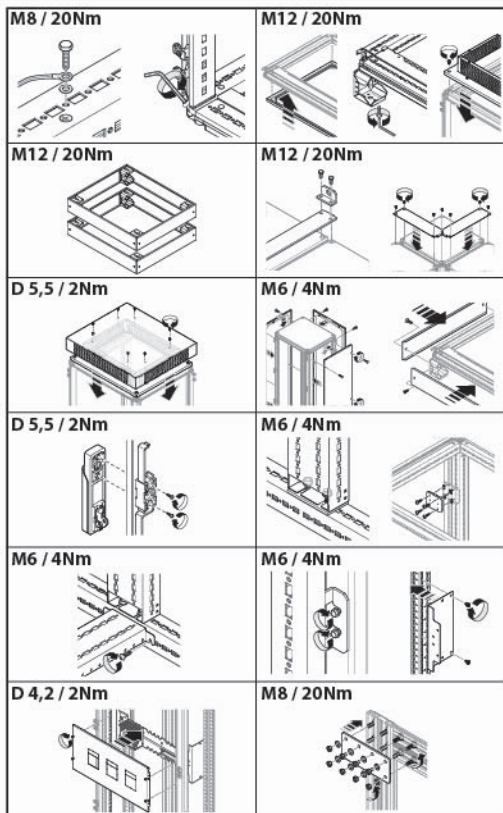


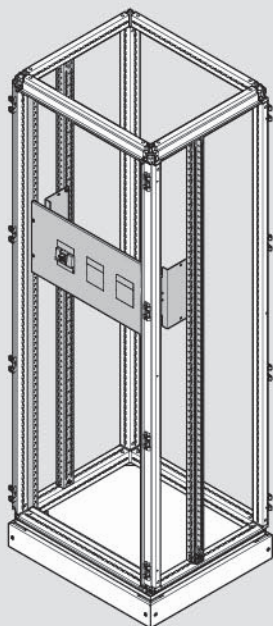


	H1
UC1800FB	1800
UC2000FB	2000

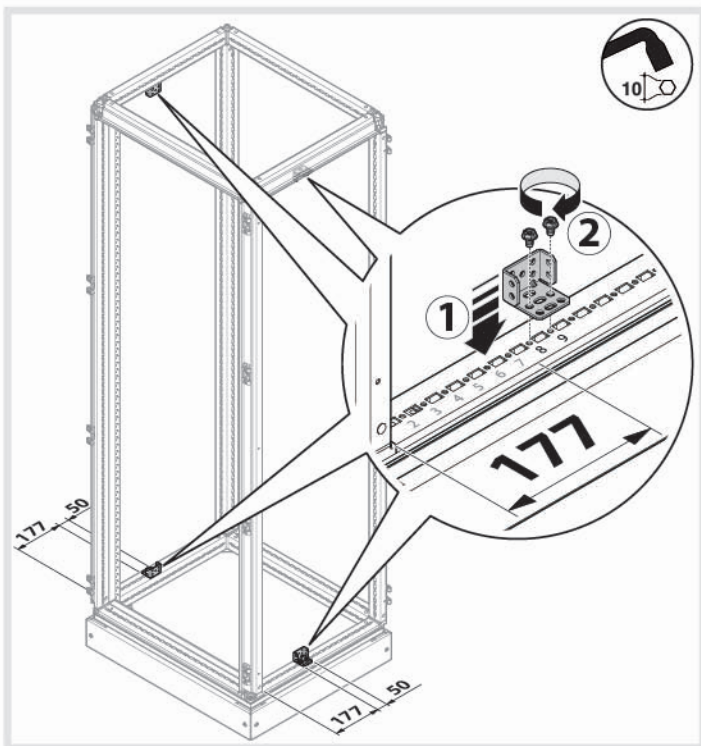


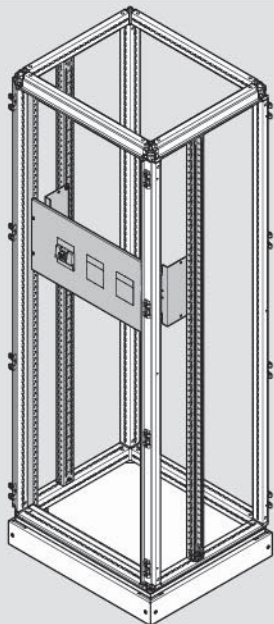


Type of Device	Installation H / V
H3	x160
	x250
	H250
H3+	H800/1000
	P160
	P250
	P630
	X630
Type of Device	Installation V
H3	H800/1600
HA	Up to 630A
HI	
HIC	
LT	Up to 400A
HFD	Up to 400A

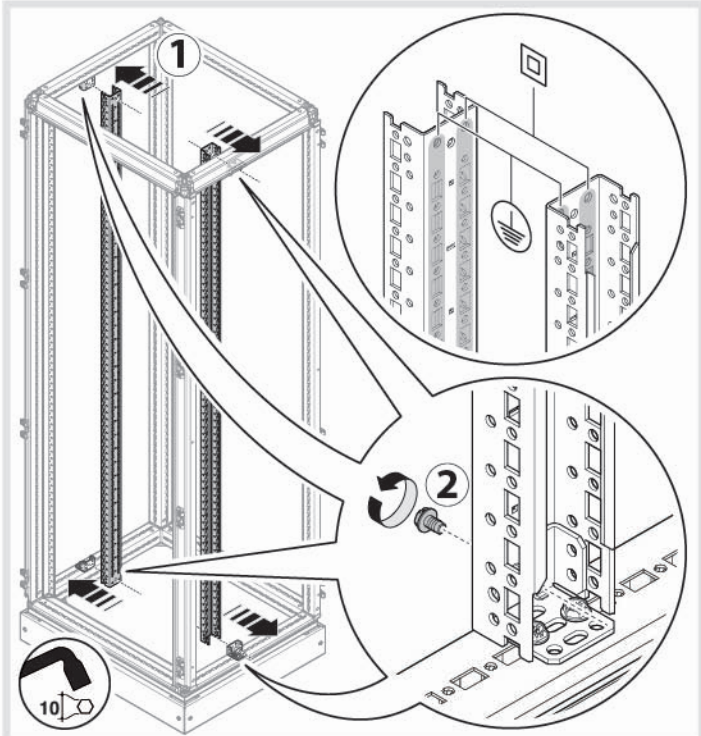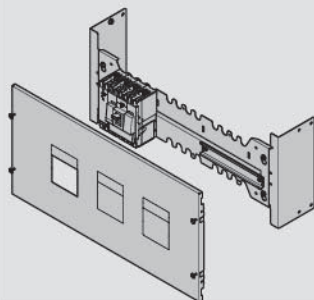


**DIRECT**  

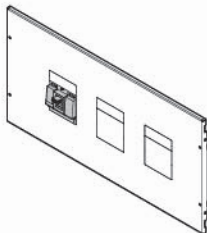


**DIRECT**  

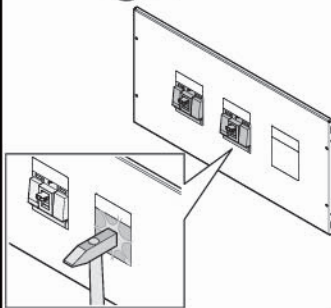




**ROTARY**  

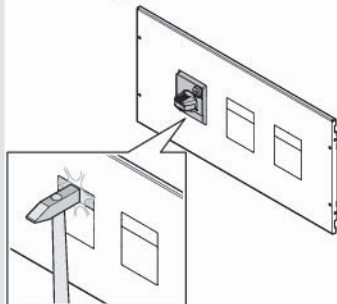

**ROTARY**  

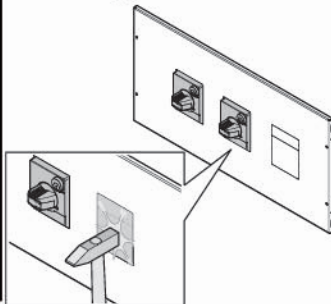




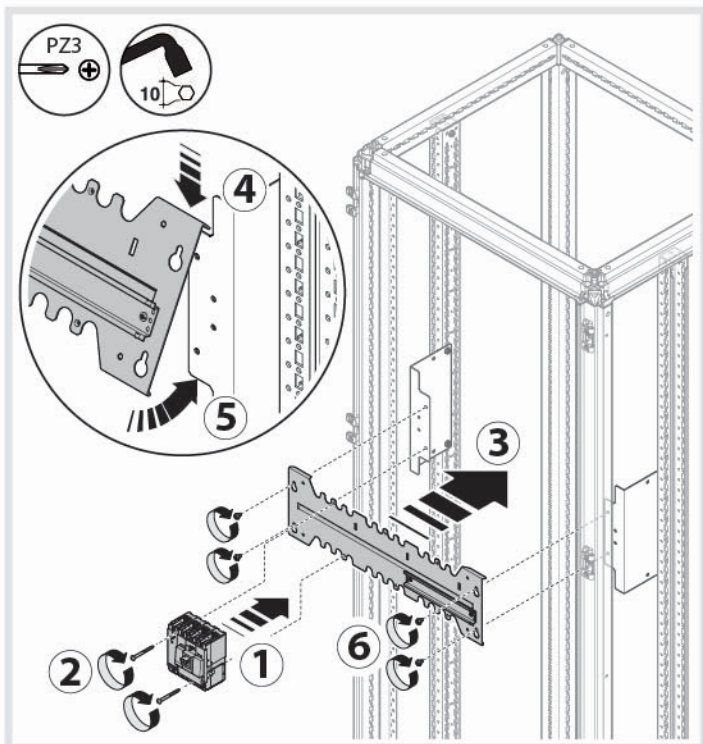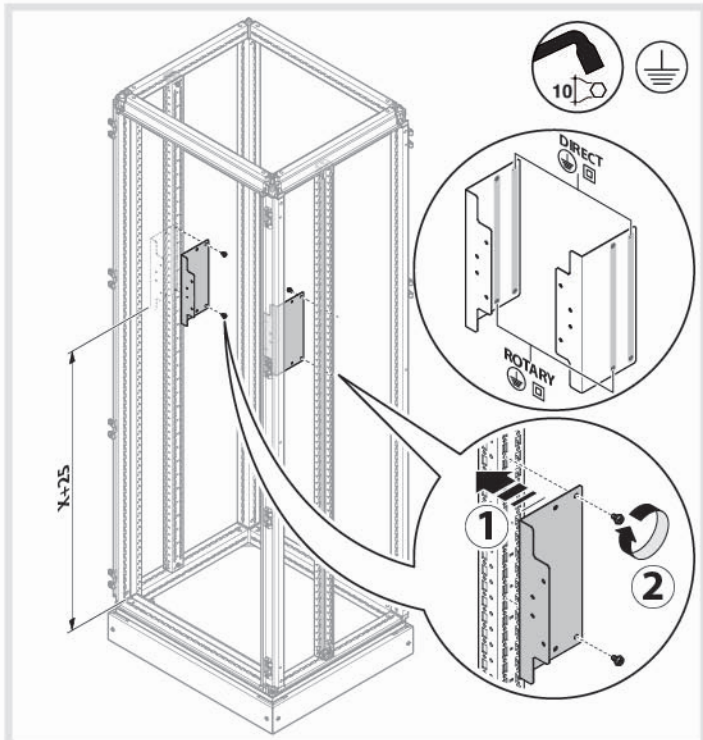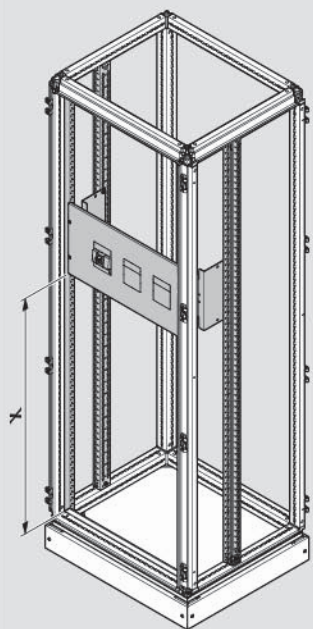




2

1

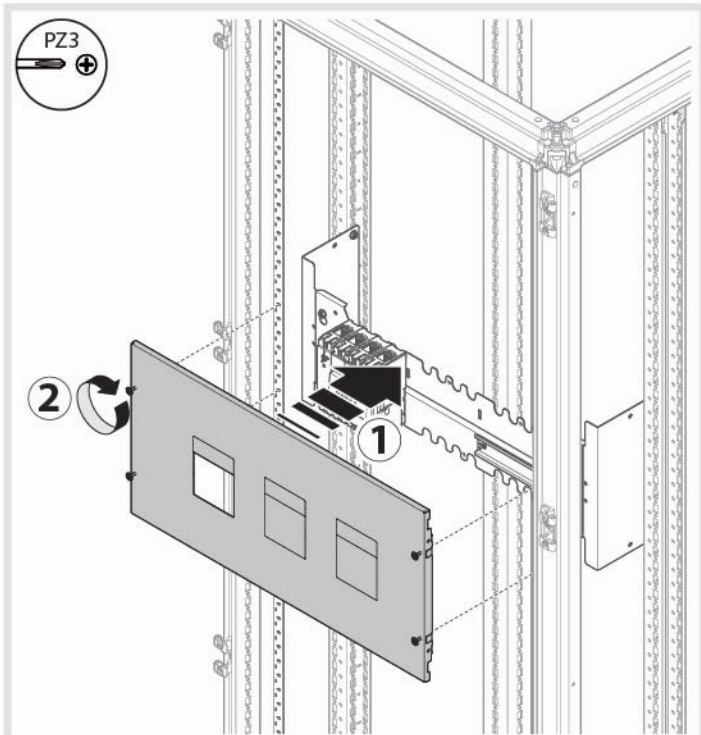

UC000XHP

x4

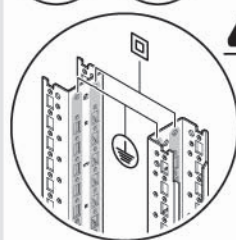


3



4

1

2



5


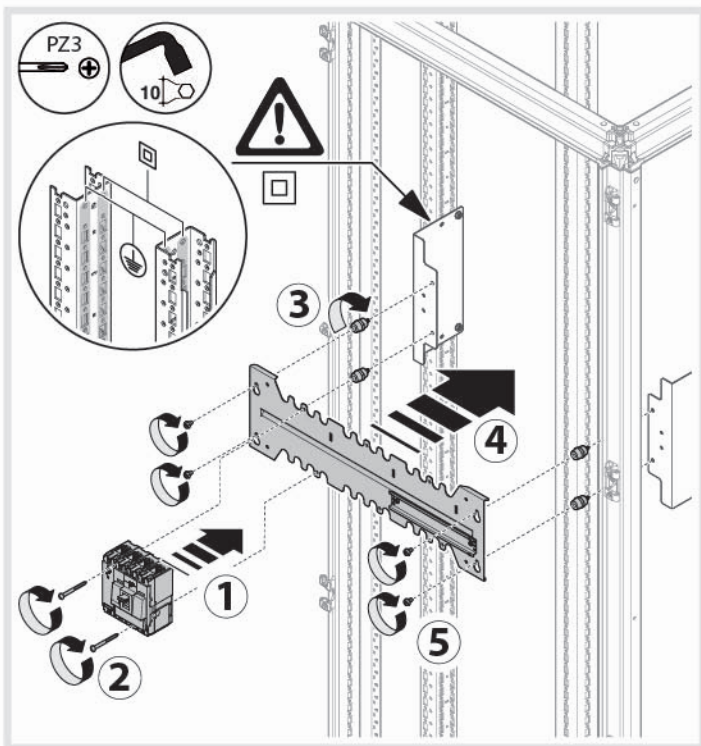


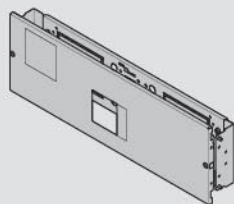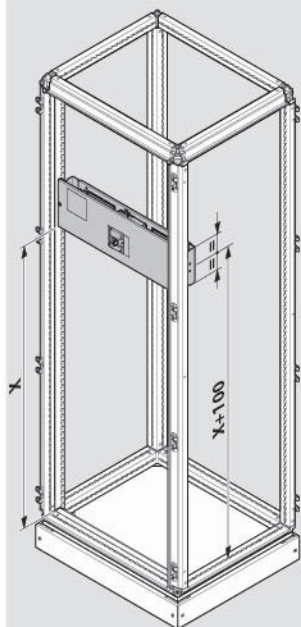

	H1
UC1800F	1800
UC2000F	2000



Type of Device	Installation H
H3+	P160 P250

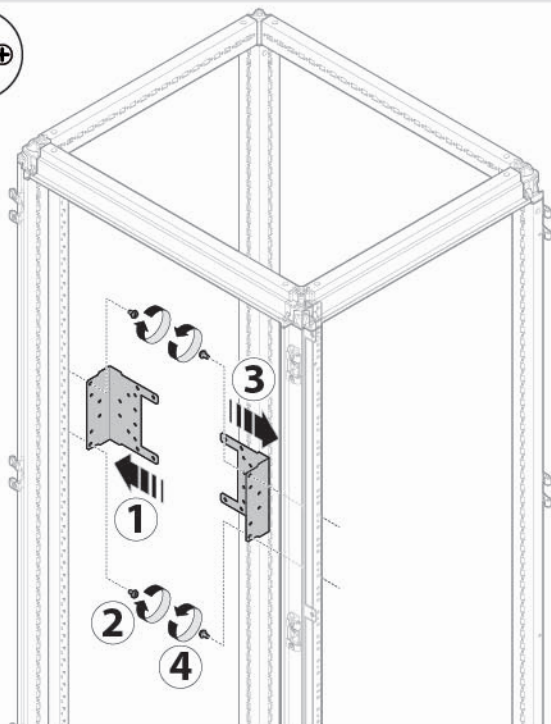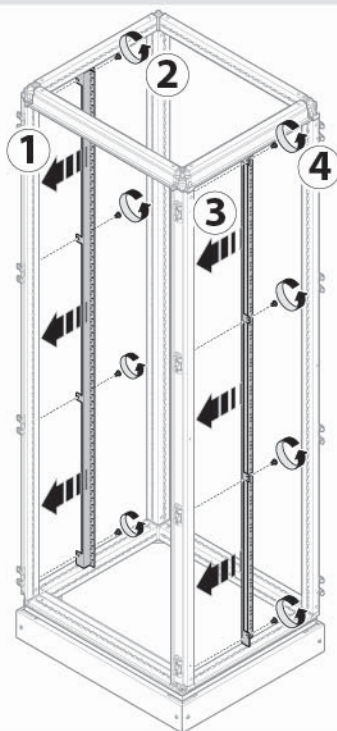



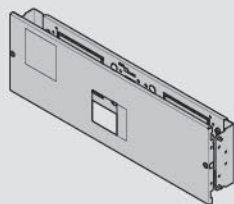
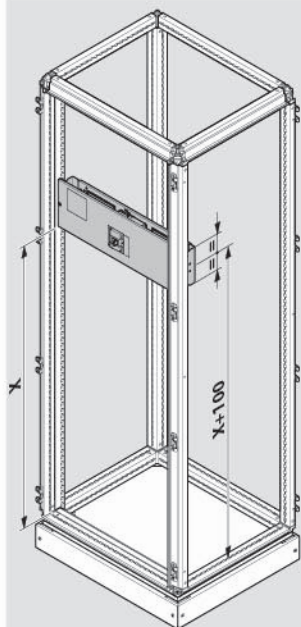


	H1
UC1800F	1800
UC2000F	2000

Type of Device	Installation H
H3+	P160 P250

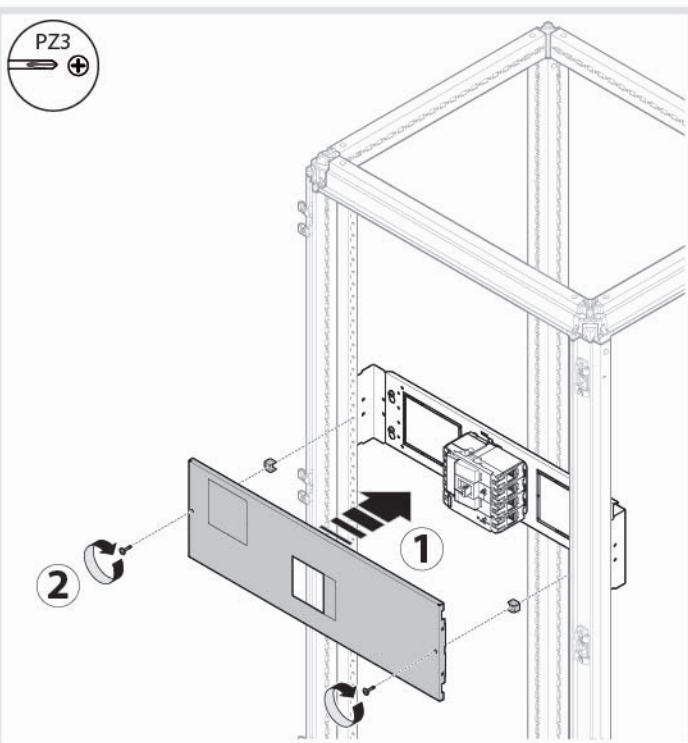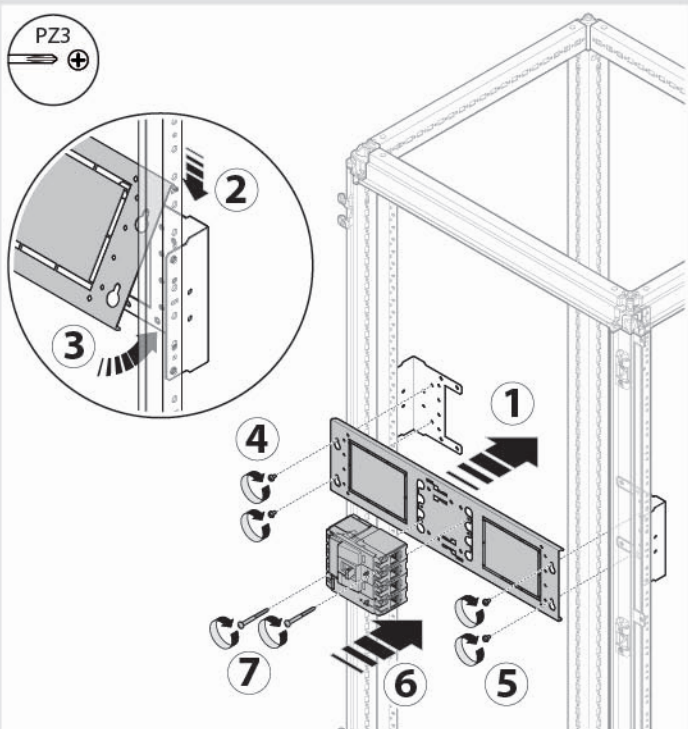





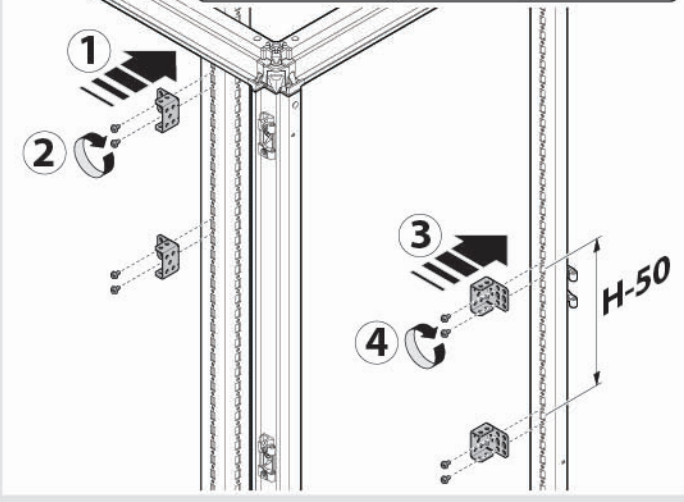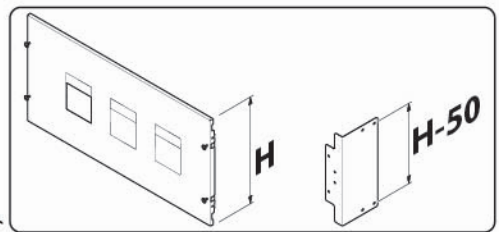
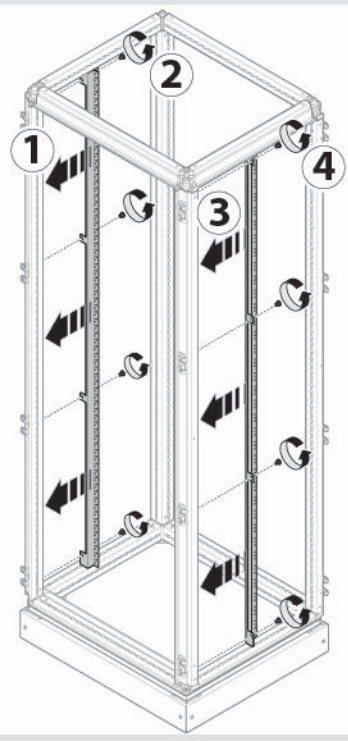
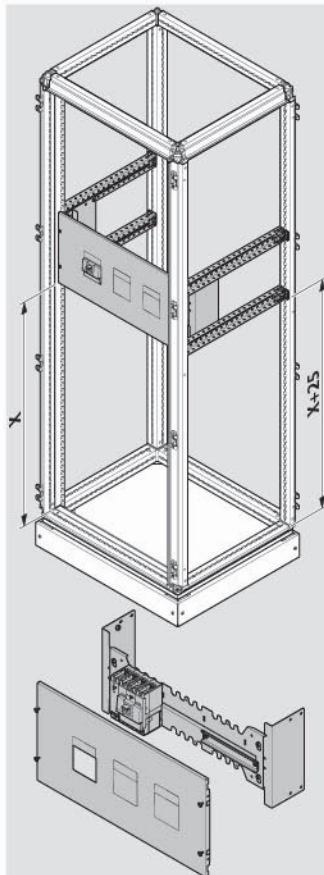





	H1		D
UC1800F UC2000F	1800 2000	UC300FU UC500FU UC700FU	400 600 800

Type of Device	Installation V	Min D
H3	x160 x250 H250 H800/1000 H1250/1600	400 mm
H3+	P160 P250 P630 X630	400 mm
HA	Up to 630A	400 mm
HI		
HIC		
LT	Up to 400A	400 mm
HFD	Up to 400A	400 mm
	800A	600 mm



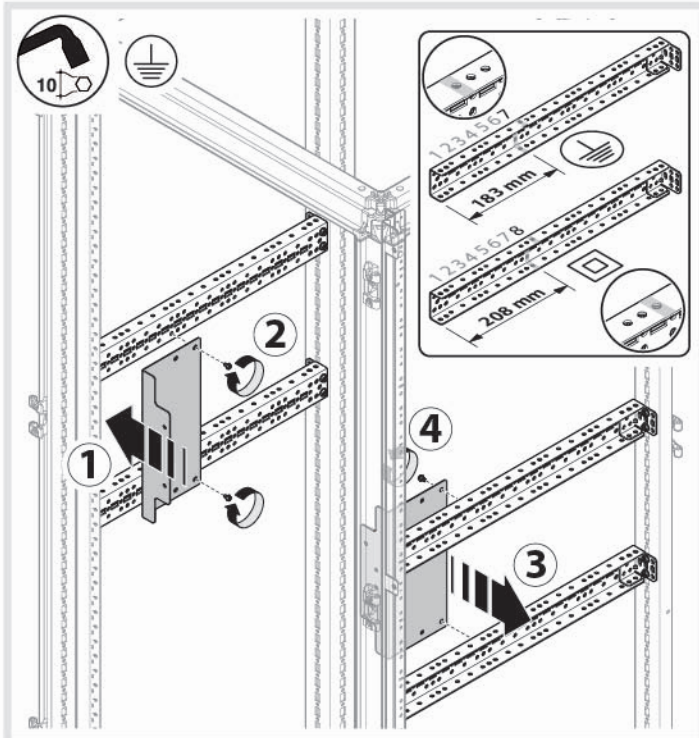
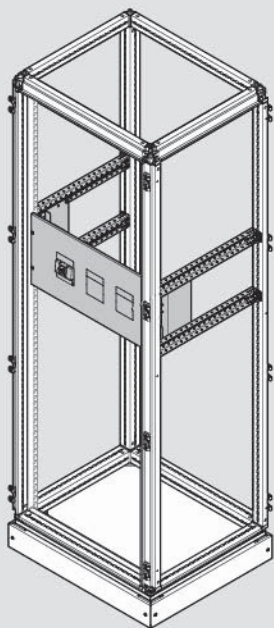


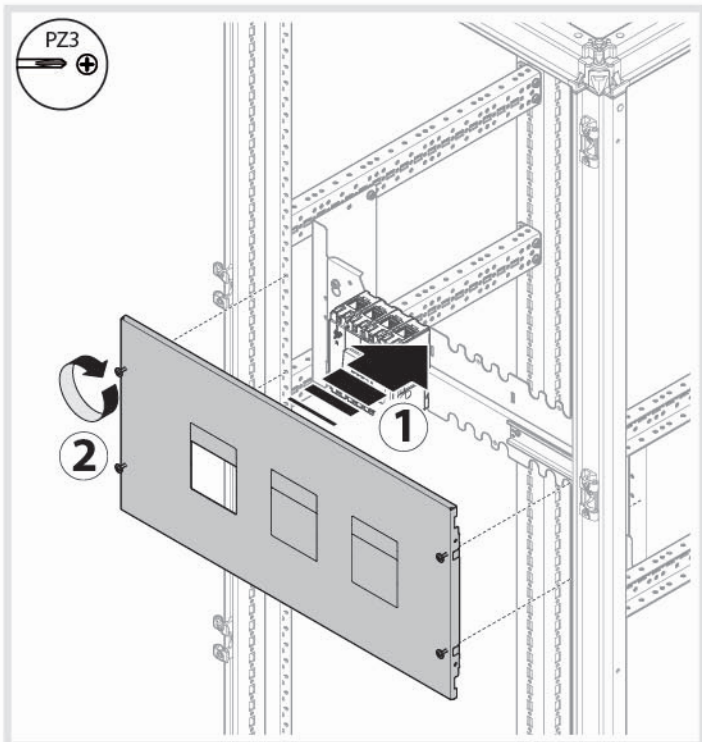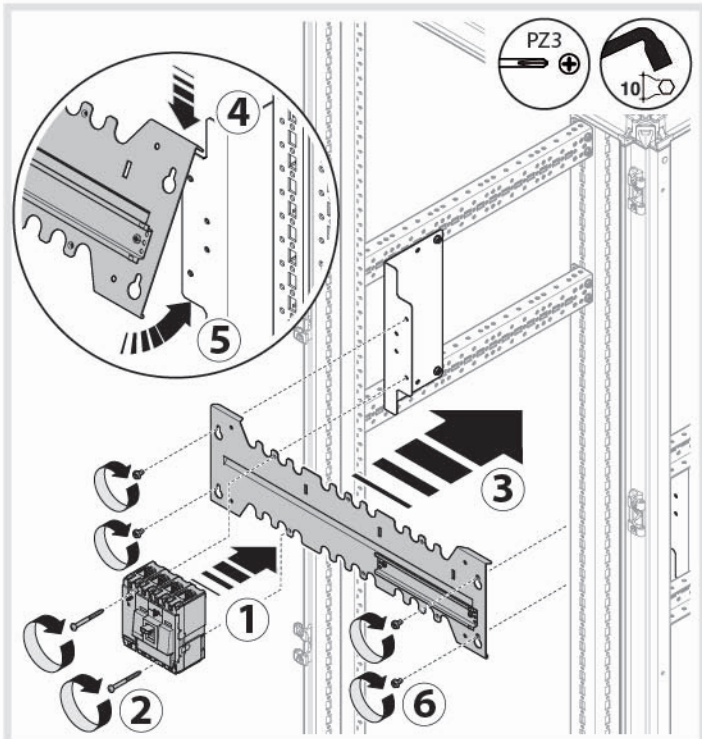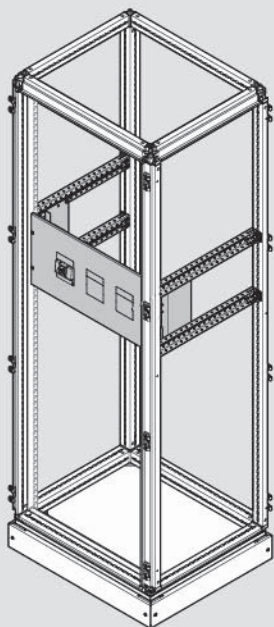


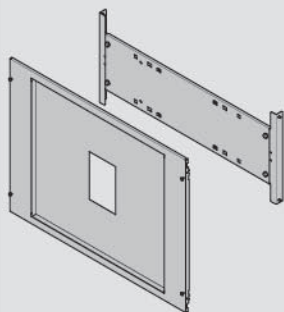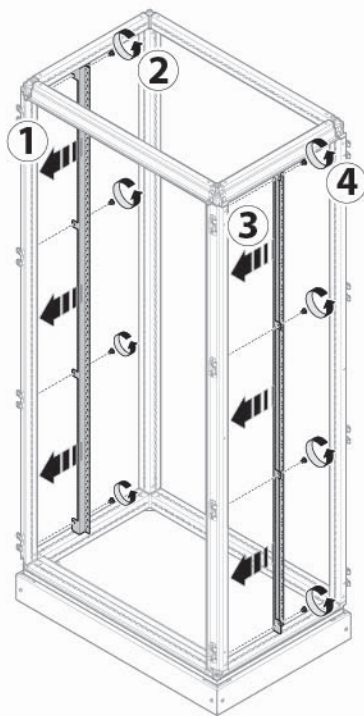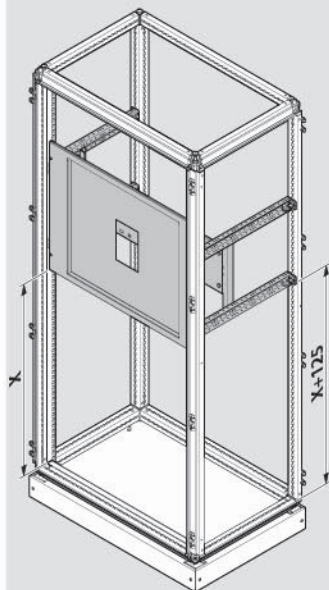

	H1		D
UC1800F UC2000F	1800 2000	UC700FU	800


Type of Device	Installation V
HA	Up to 3200A
HI	
HIC	

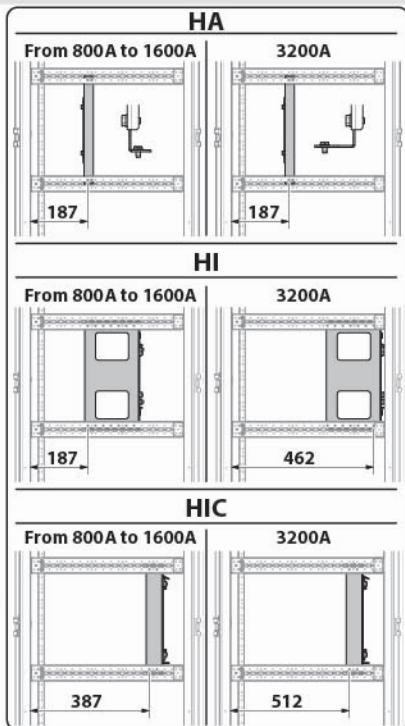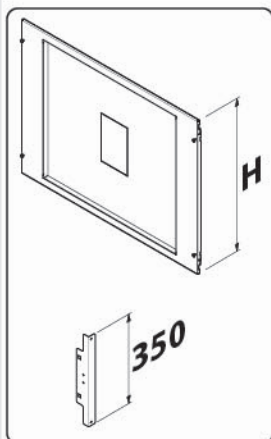

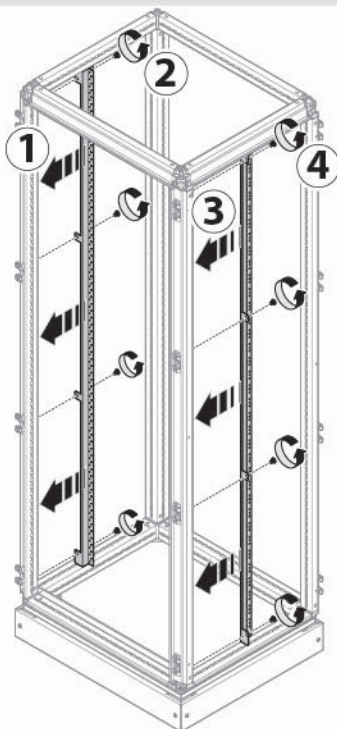


H1

UC1800F 1800  
UC2000F 2000

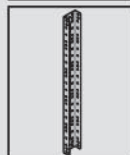


P

UC300FU 400  
UC500FU 600  
UC700FU 800

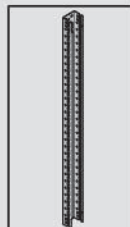



H



UC300BU 300  
UC400BU 400  
UC500BU 500  
UC600BU 600  
UC700BU 700  
UC800BU 800  
UC900BU 900  
UC1000BU 1000


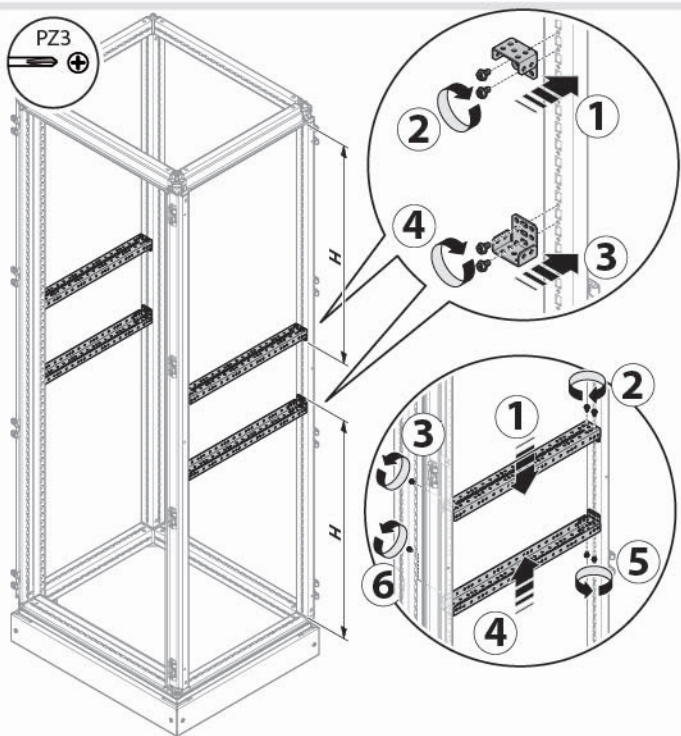





2b


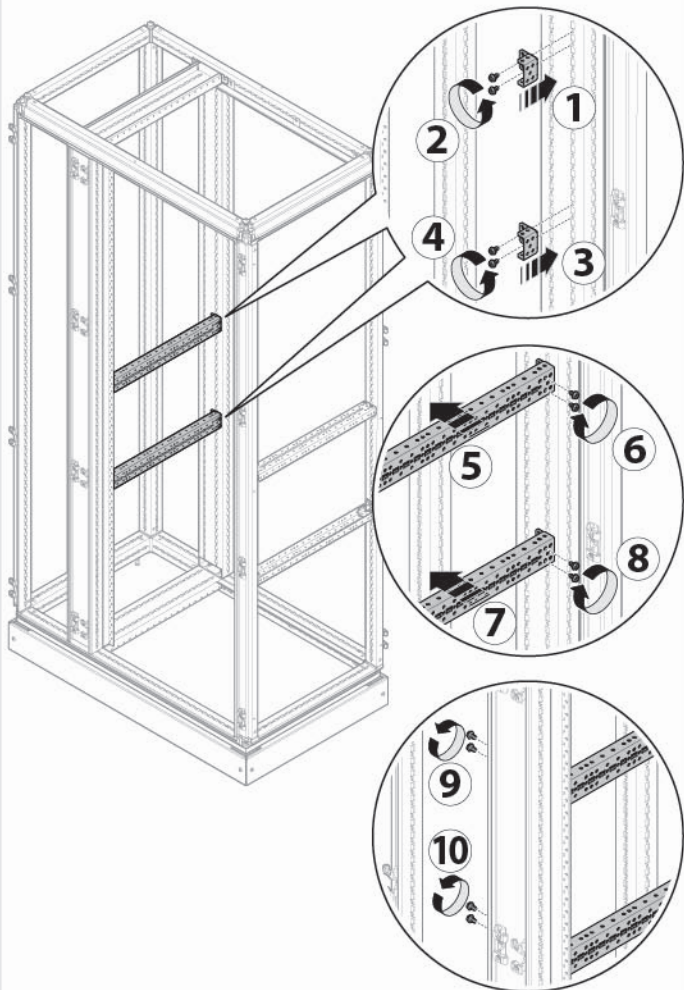
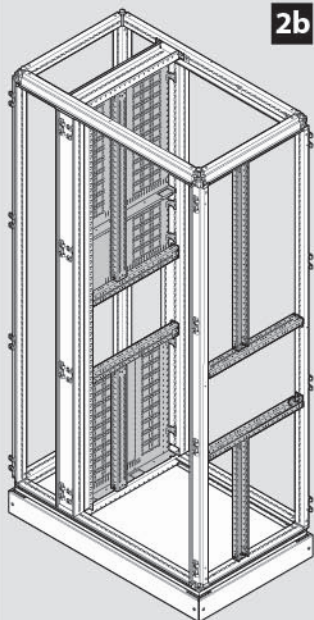


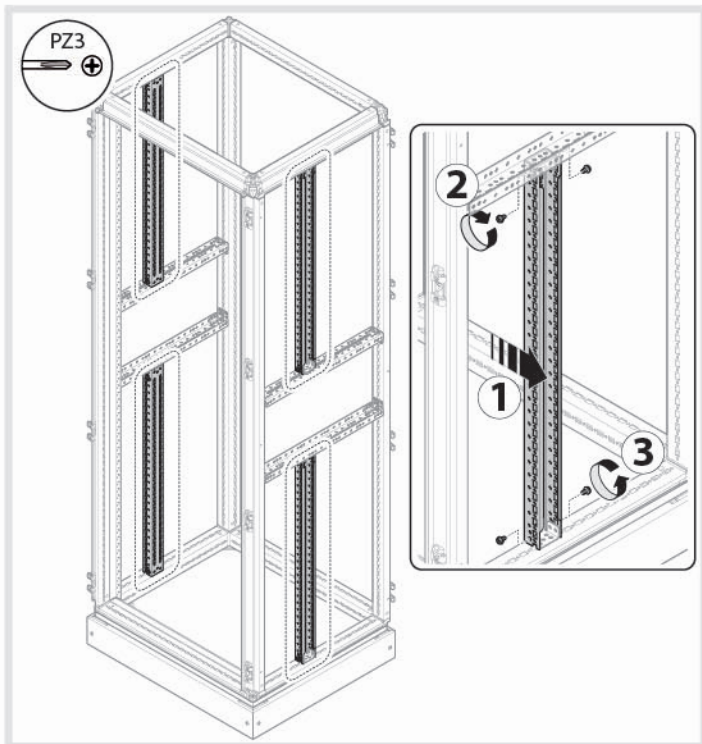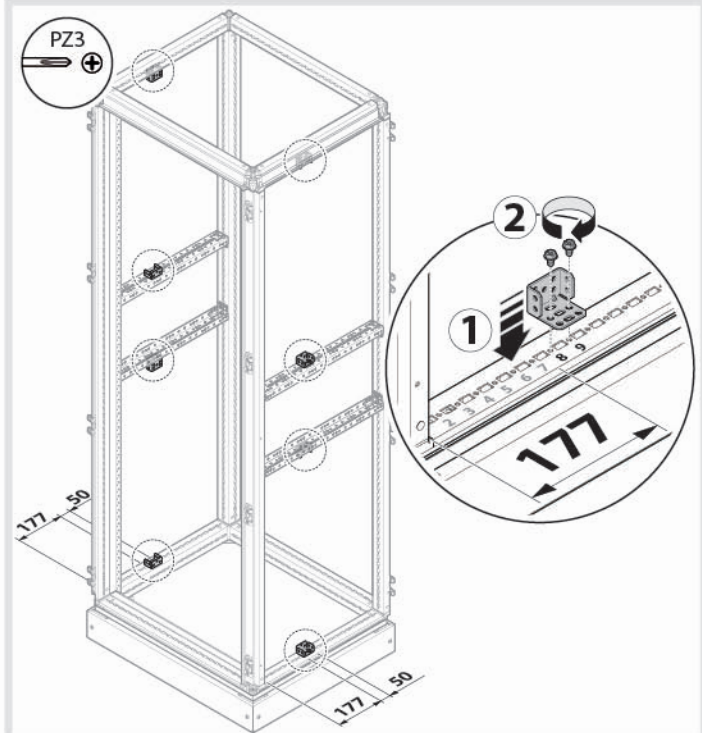

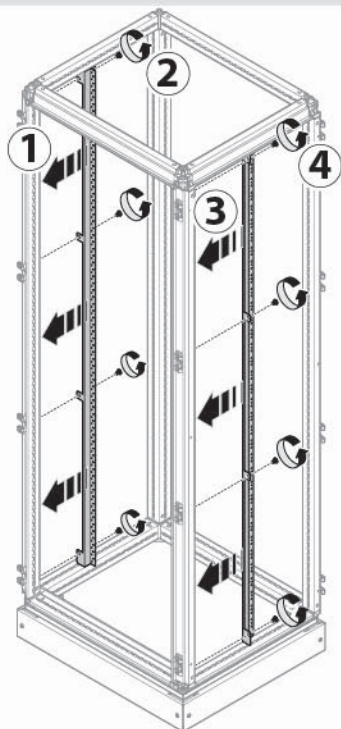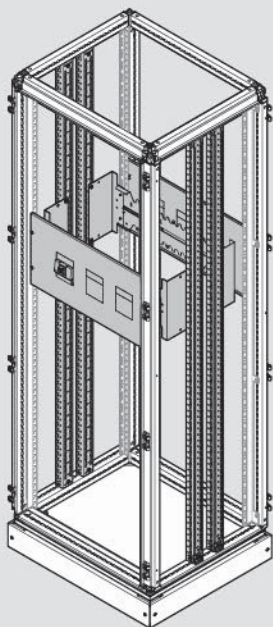



	H1	Q.TA
UC1800FB	1800	2
UC2000FB	2000	2

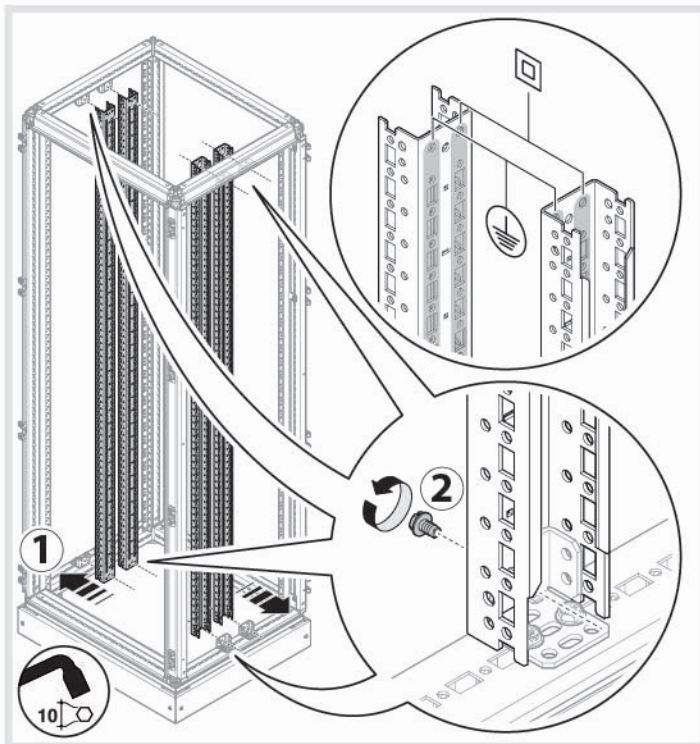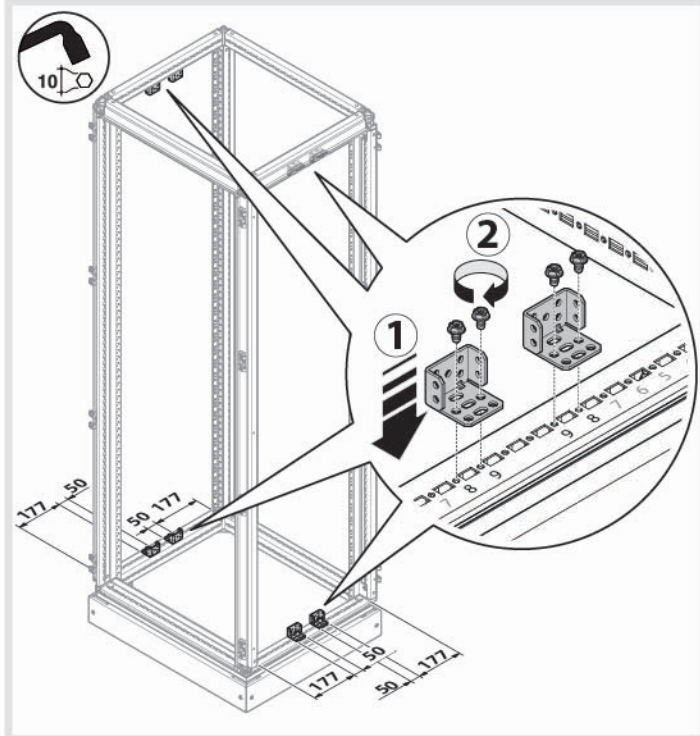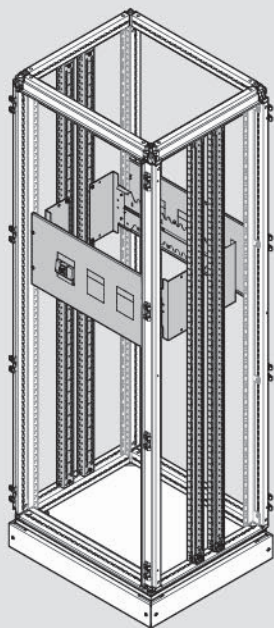

 
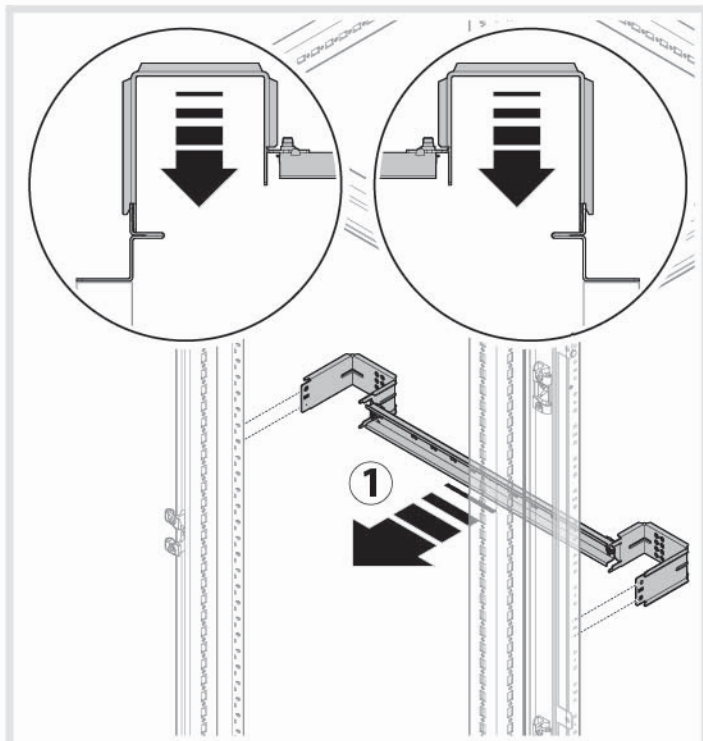







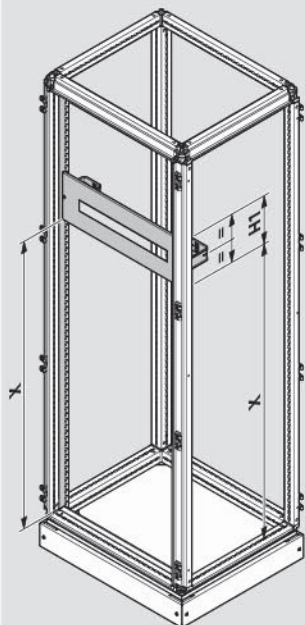


	W1	H1
UC1530MDN	350	150
UC1560MDN	600	150
UC1580MDN	800	150
UC2030MDN	350	200
UC2060MDN	600	200
UC2080MDN	800	200


	H1
UC1800F	1800
UC2000F	2000



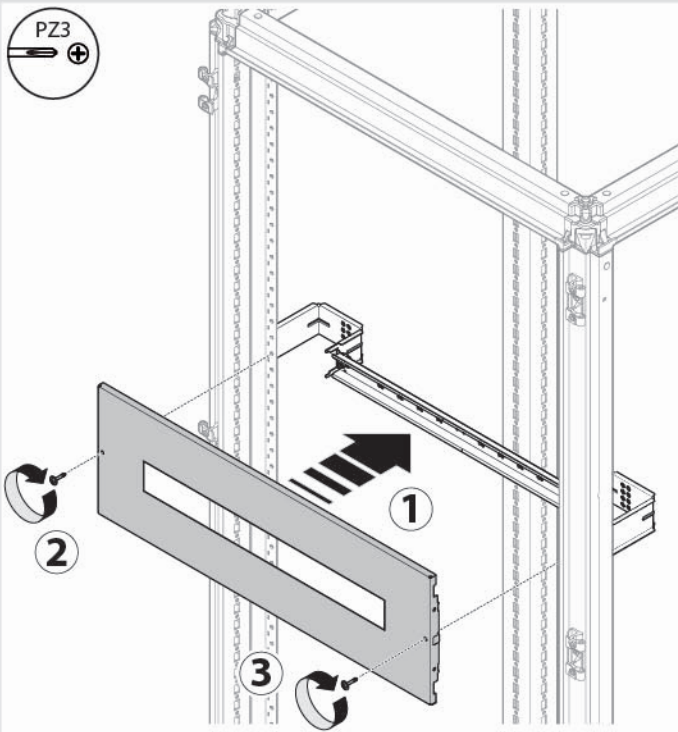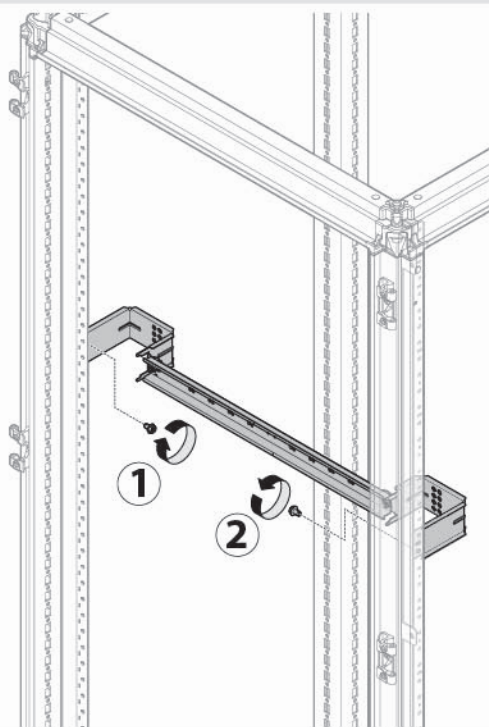
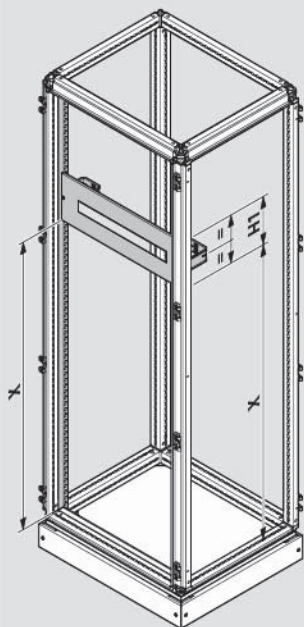


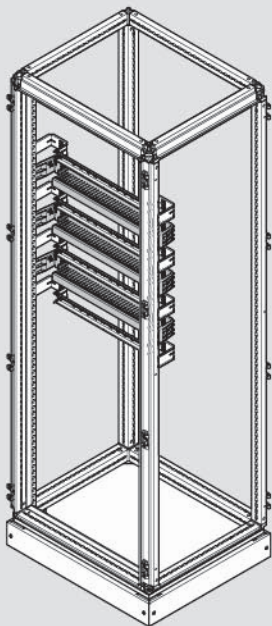


UC000HTS

 




Horizontal	H	L	W1	Fixation
UC911	80	30	350	Clip
UC912	80	30	600	Clip
UC913	80	30	800	Clip
B02567	80	40	~	Clip

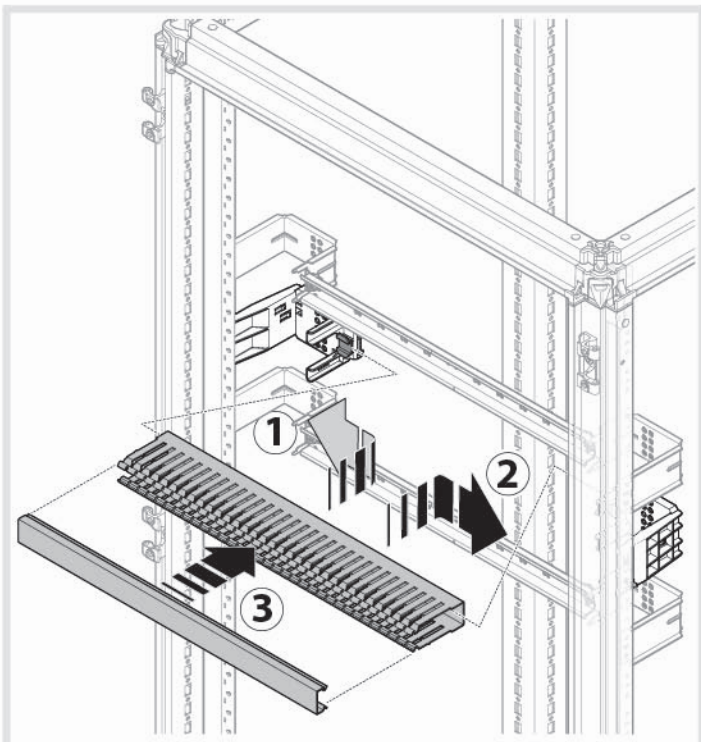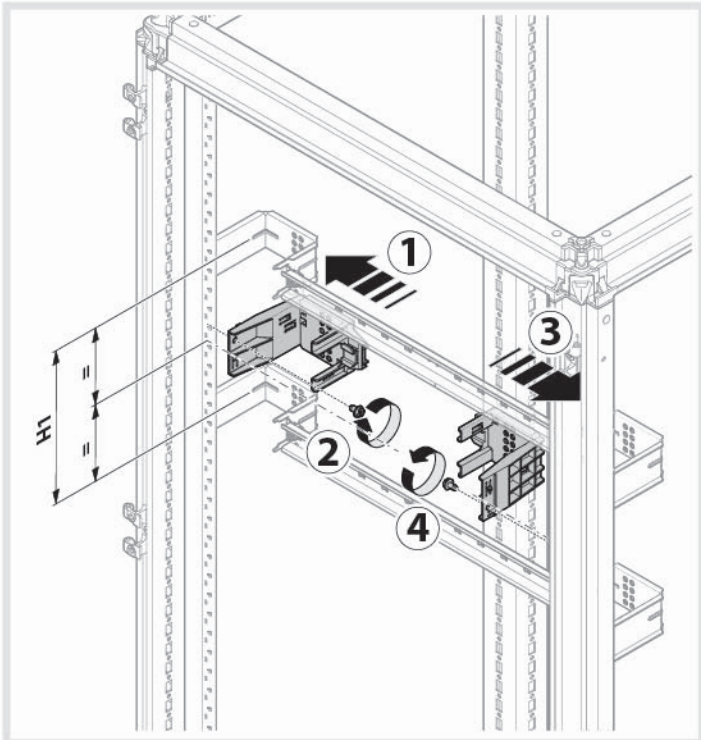


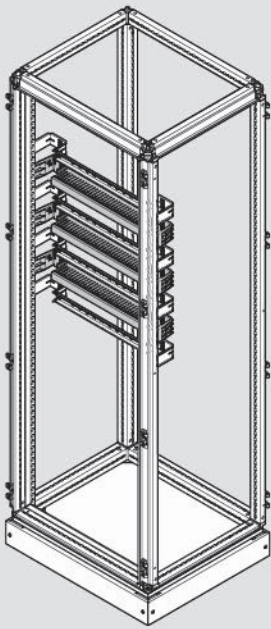


Horizontal	H	L	W1	Load >1kg
UC912	80	30	350	Add. Dln
UC913	80	30	600	Add. Dln
B02567	80	40	800	Add. Dln


W1	L
350	180
600	430
800	630

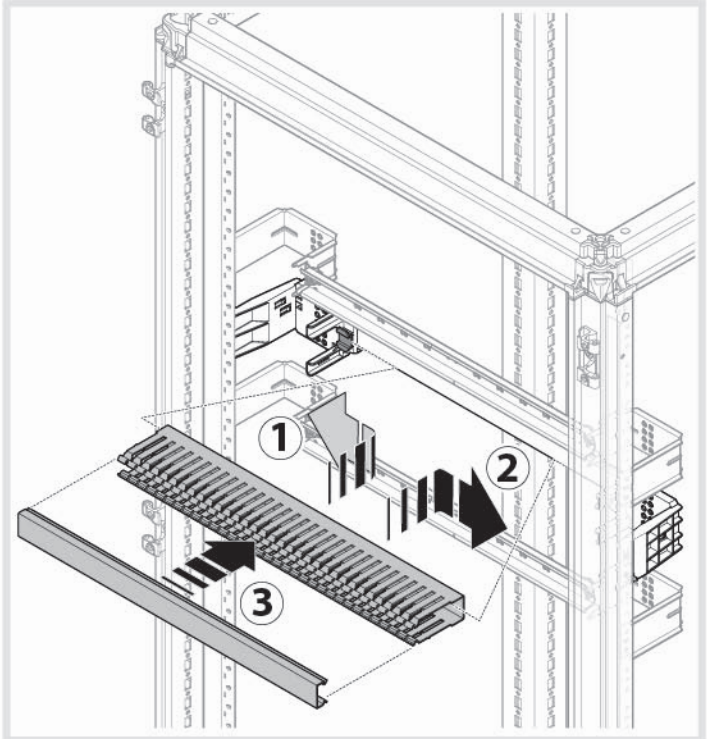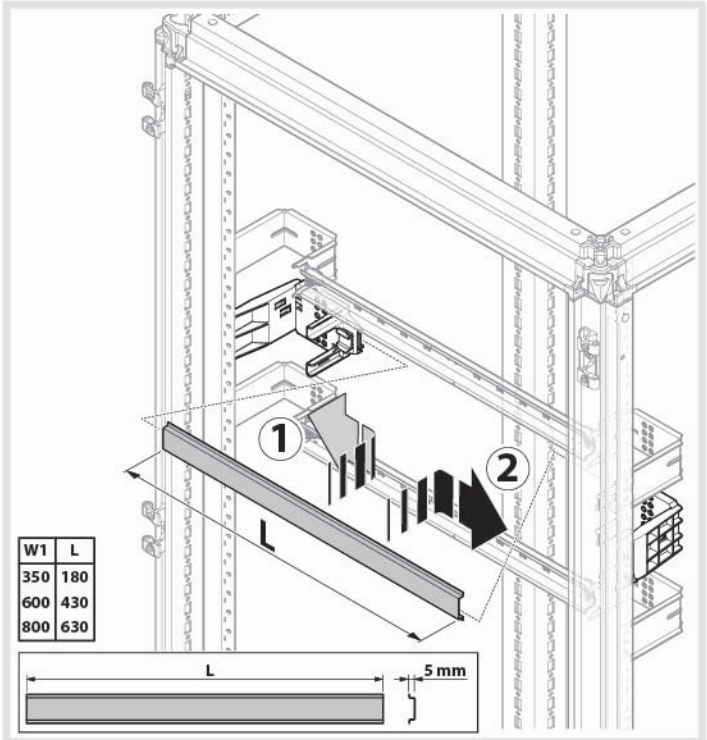 



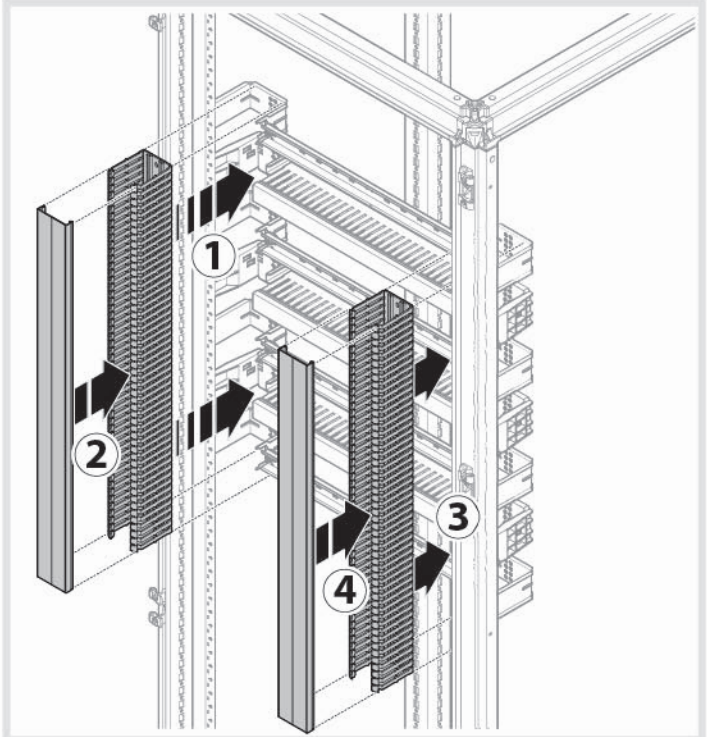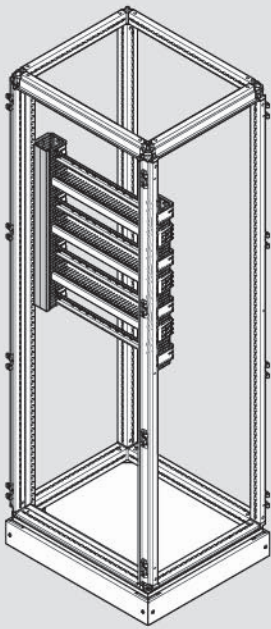

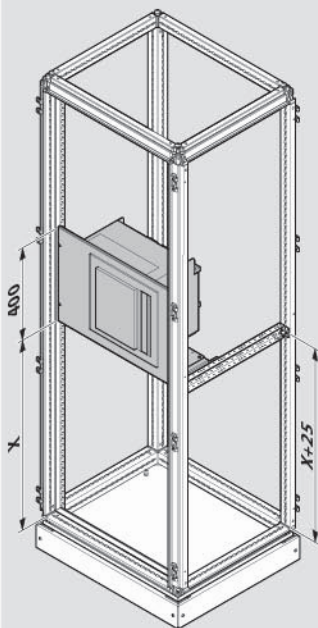



Vertical	H	L	H1	Fixation
UC916	80	60	~	Clip
B02570	80	60	~	Clip
B02570	80	40	~	Rivet









	Device 3/4 Poles	W	Type
	HW1		
UC6040HW1	1600A	600	FIX D/W
UC8040HW1	1600A	800	FIX D/W

	H1
UC1800F	1800
UC2000F	2000


	D
UC300FU	400
UC500FU	600
UC700FU	800

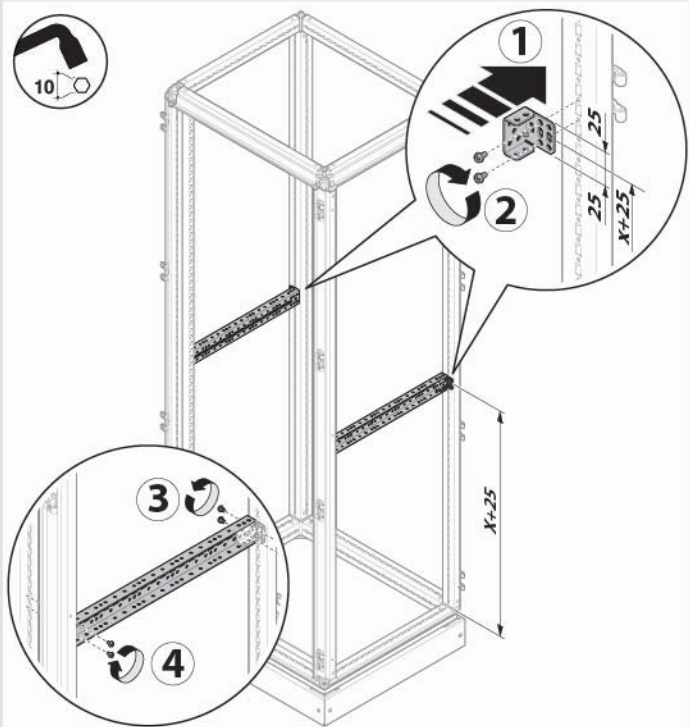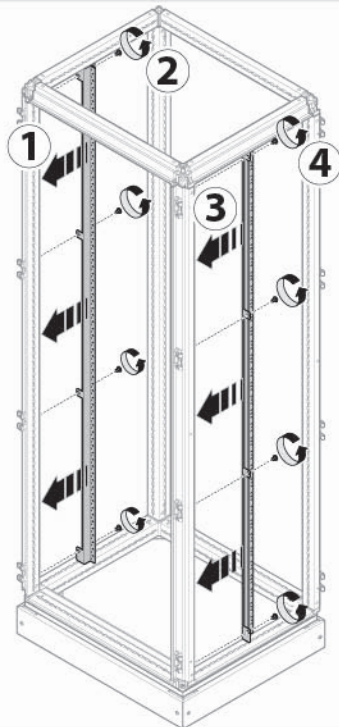

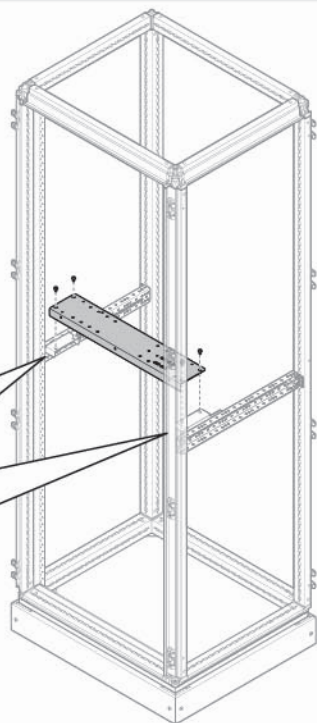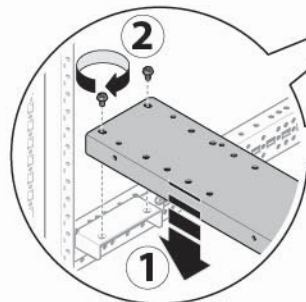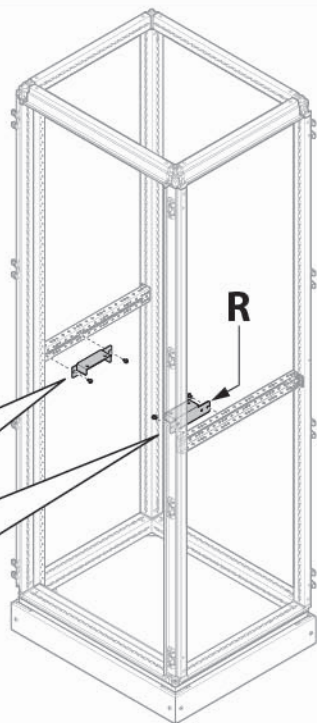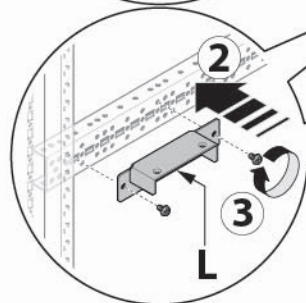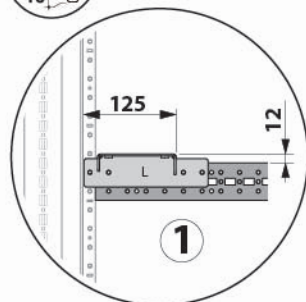

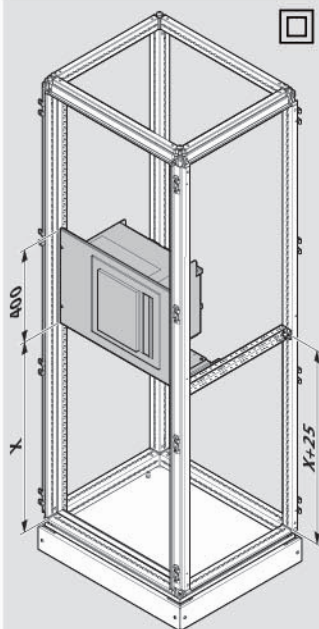


UCCL2HW1

 



	Device	W	Type
	3/4 Poles		
	HW1		
UC6040HW1	1600A	600	FIX D/W
UC8040HW1	1600A	800	FIX D/W


	H1
UC1800F	1800
UC2000F	2000

	D
UC300FU	400
UC500FU	600
UC700FU	800

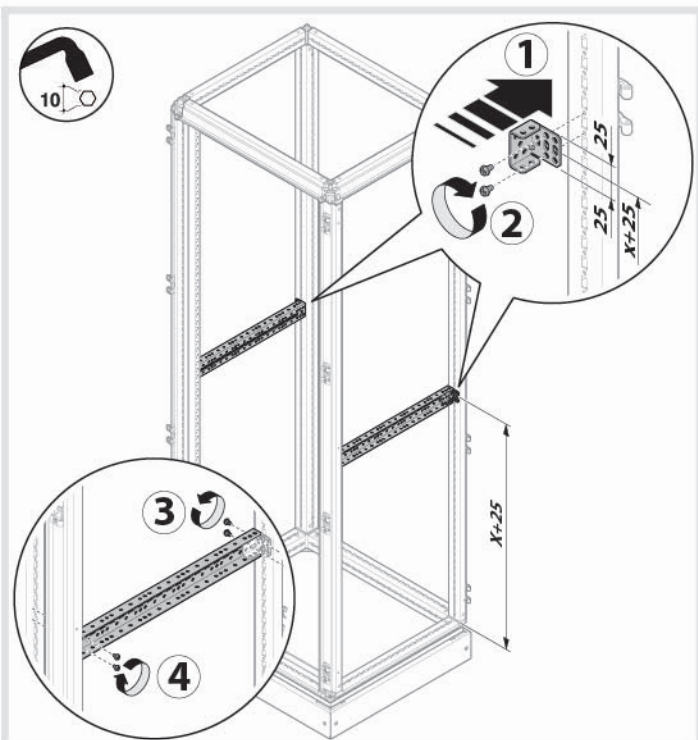




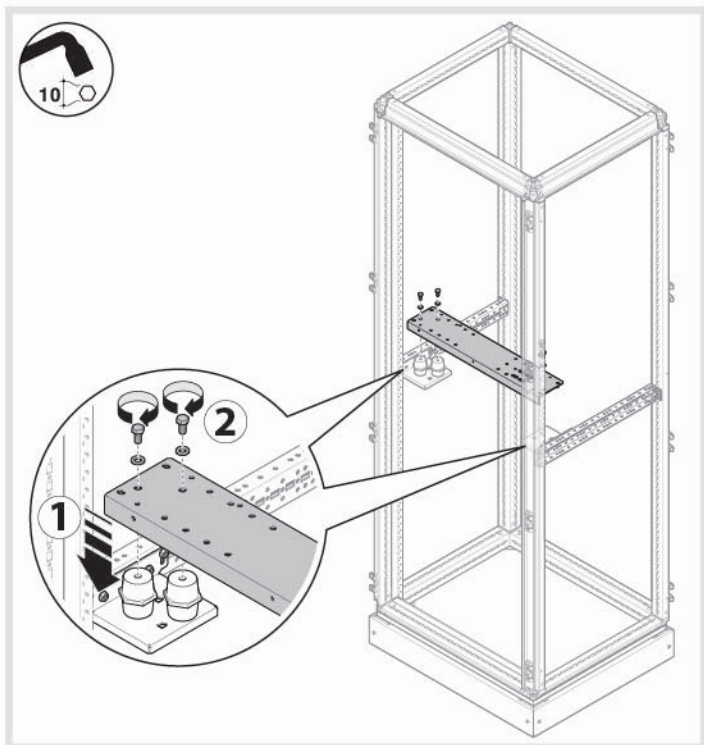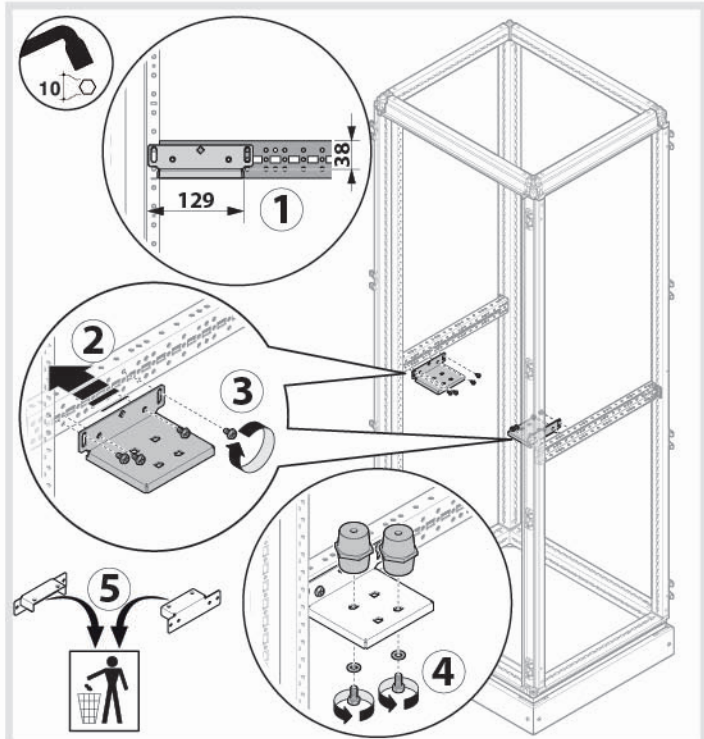

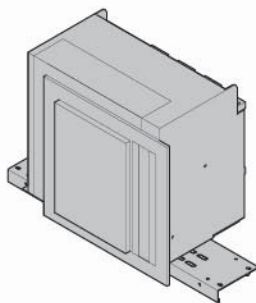


**FIX - 4P**


**FIX - 3P**

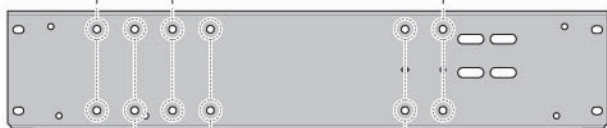



**D/W - 3P**


**D/W - 4P**

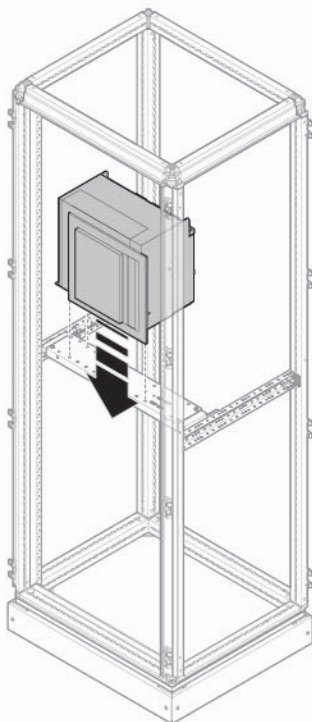

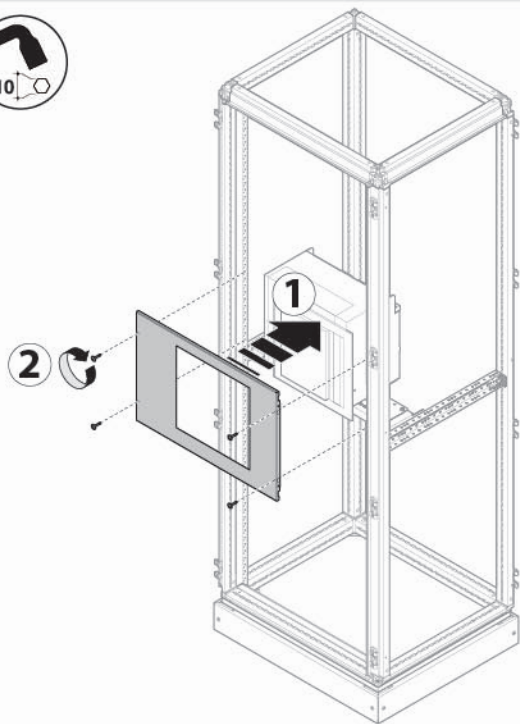
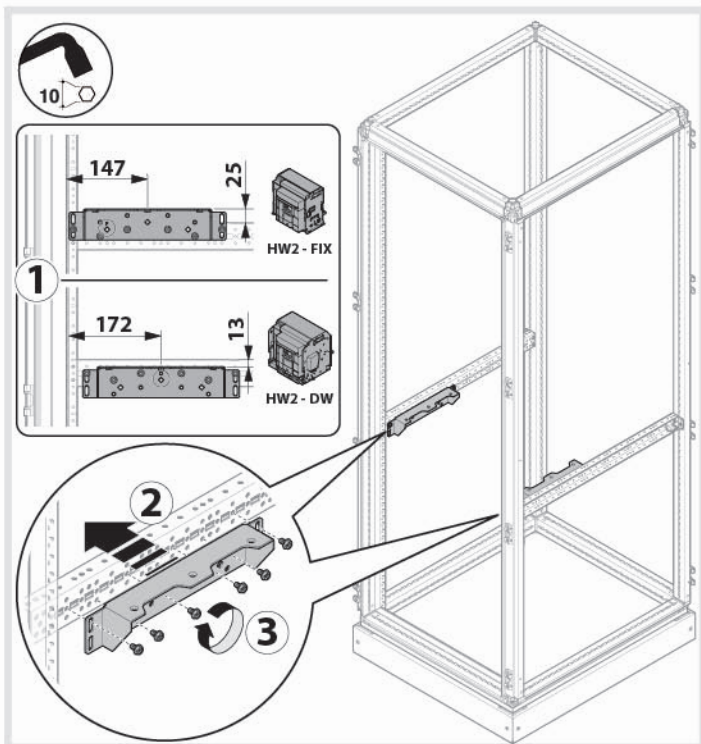
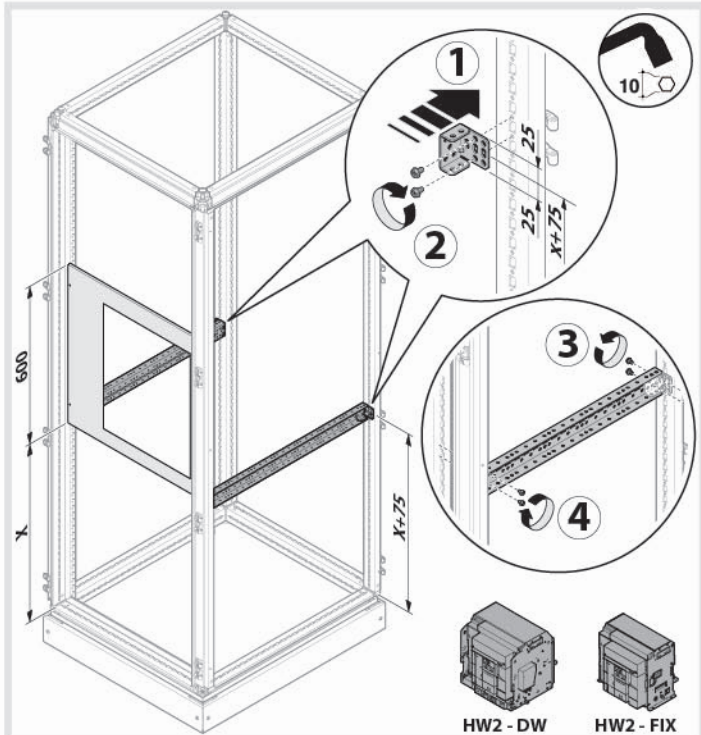


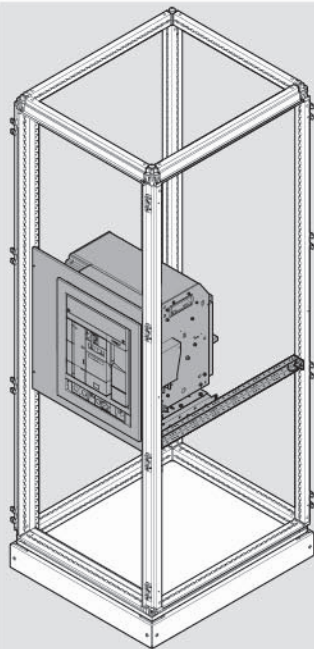



	Device 3/4 Poles	W	Type
	HW2		
UC6060HW2	≤2500A	600	FIX D/W
UC8060HW2	≤2500A	800	FIX D/W


	H1
UC1800F	1800
UC2000F	2000



	D
UC700FU	800








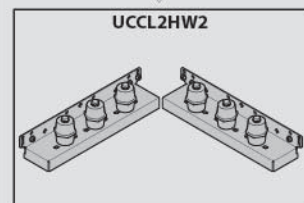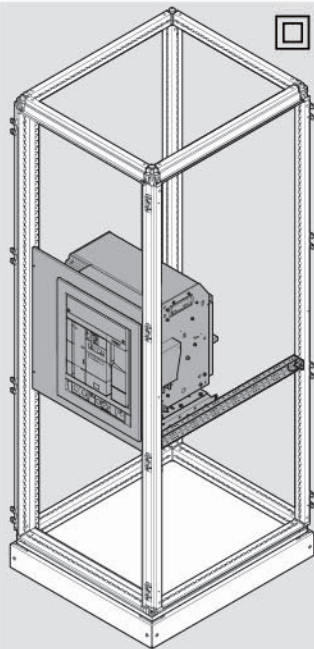


 



	Device 3/4 Poles	W	Type
	HW2		
UC6060HW2	≤2500A	600	FIX D/W
UC8060HW2	≤2500A	800	FIX D/W

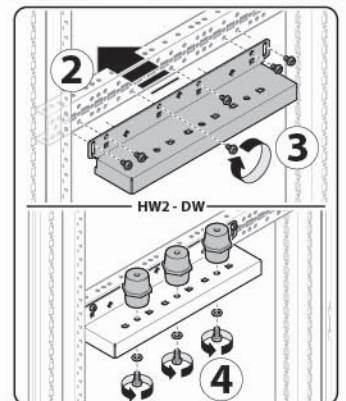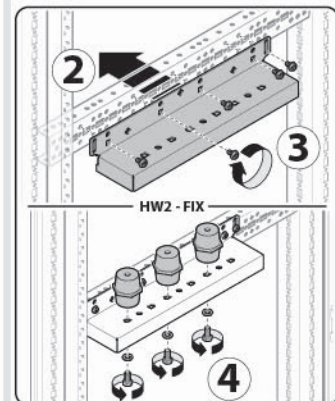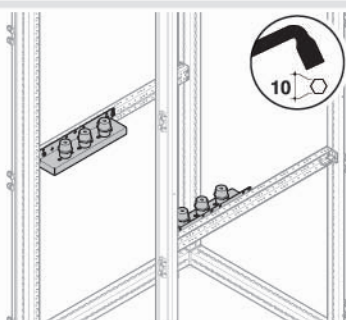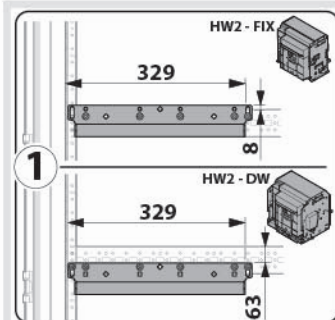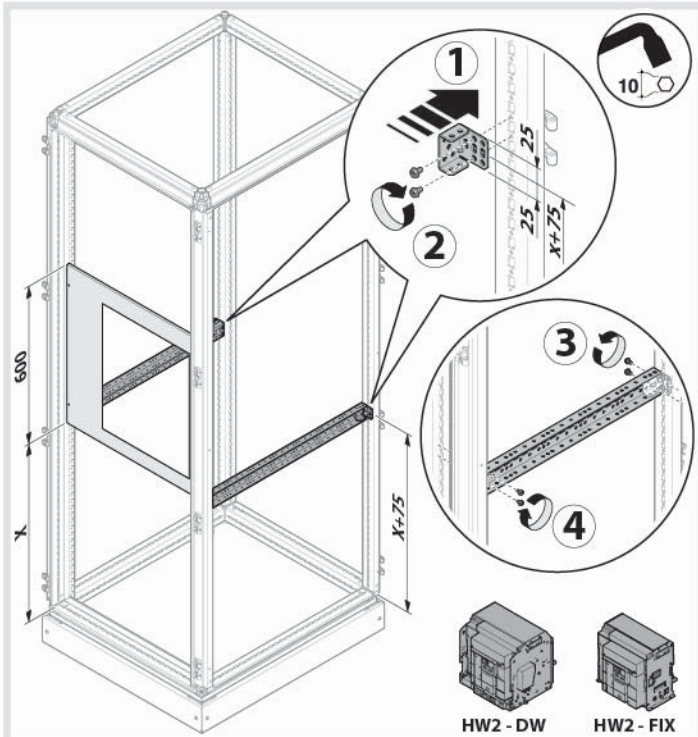
	H1		D
UC1800F UC2000F	1800 2000	UC700FU	800


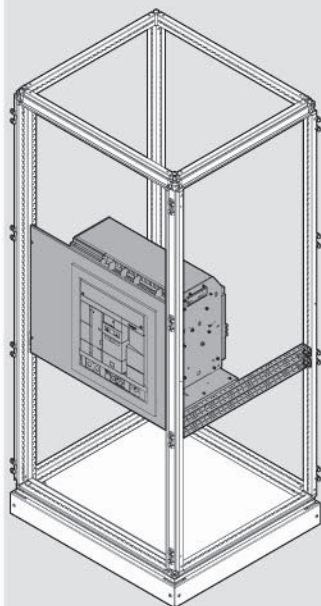







	Device	W	Type
	3/4 Poles		
	HW4		
UC8060FHW4	4000A	800 mm	FIX
UC8060DHW4	4000A	800 mm	D/W



	H1
UC1800F	1800
UC2000F	2000





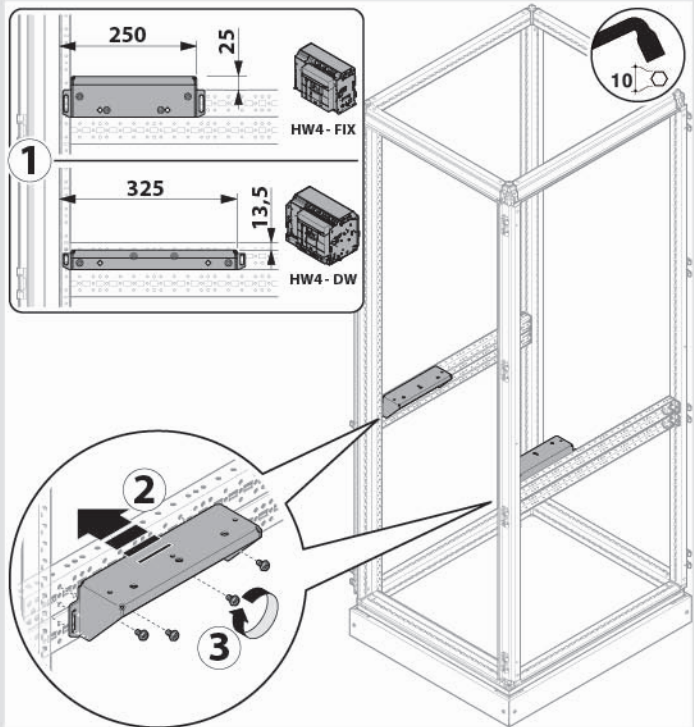
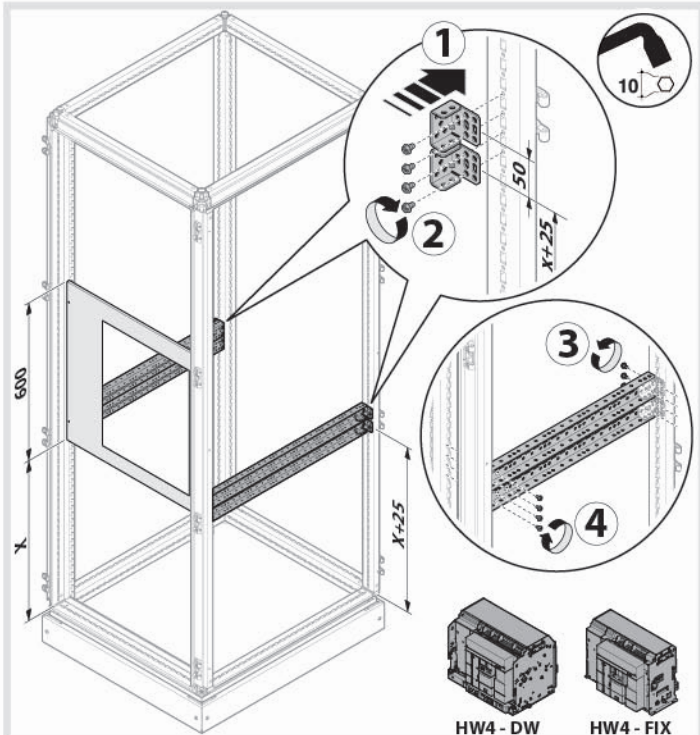
	D
UC700FU	800

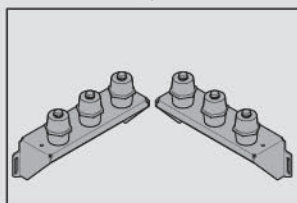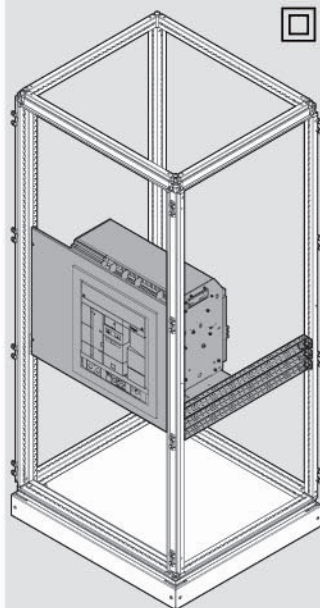

 


	Device 3/4 Poles	W	Type
	HW4		
UC8060FHW4	≤4000A	800	FIX
UC8060DHW4	≤4000A	800	D/W

	H1		D
UC1800F	1800	UC700FU	800
UC2000F	2000		

  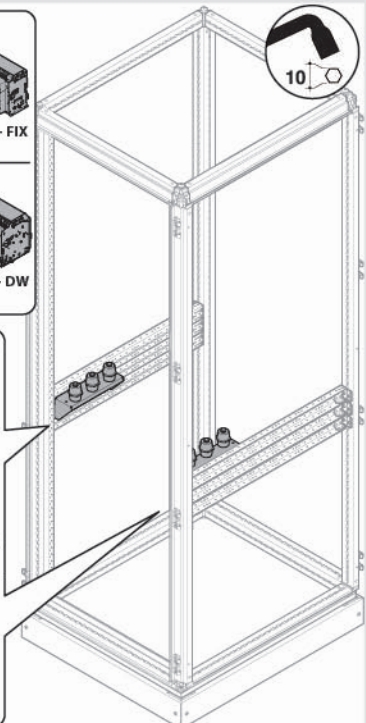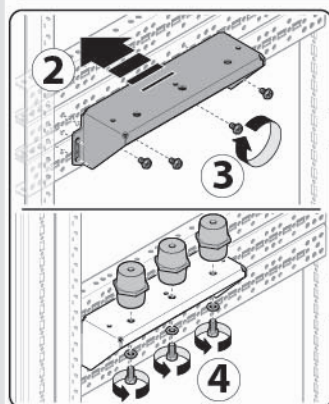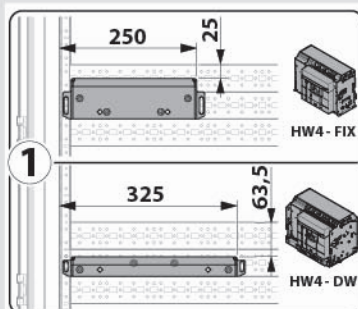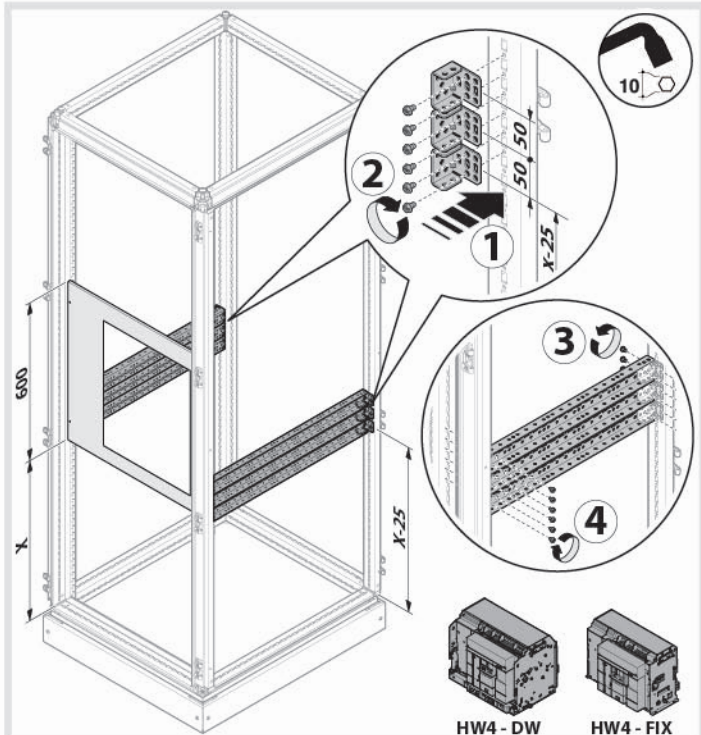



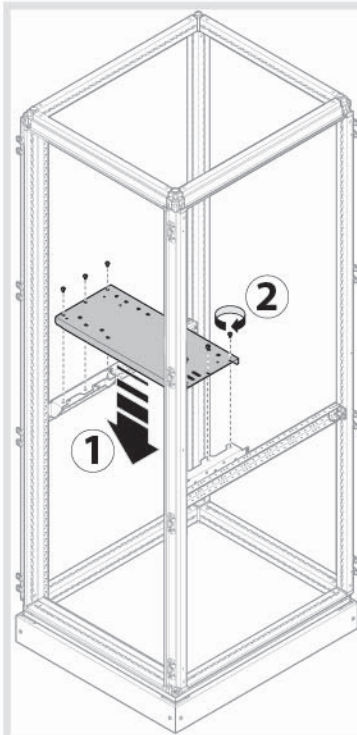


BACK



HW2-DW-3P

 HW2-DW-4P




HW2 - DW

BACK




HW4-DW-3P

HW4-DW-4P

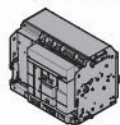

HW4 - DW

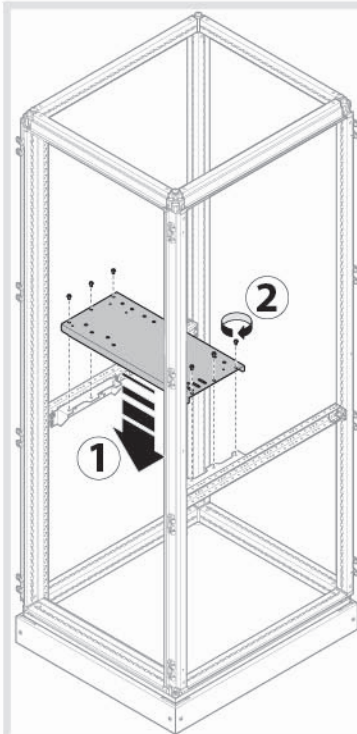


BACK




HW2-FIX-3P

 HW2-FIX-4P




HW2 - FIX

BACK

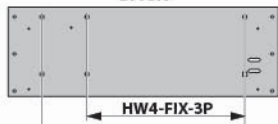



HW4-FIX-3P

 HW4-FIX-4P





HW4 - FIX



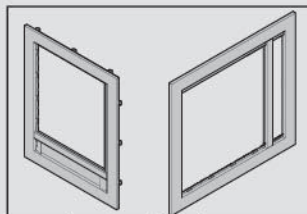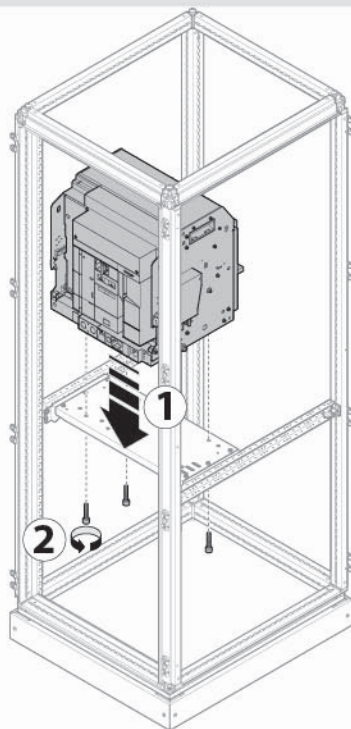

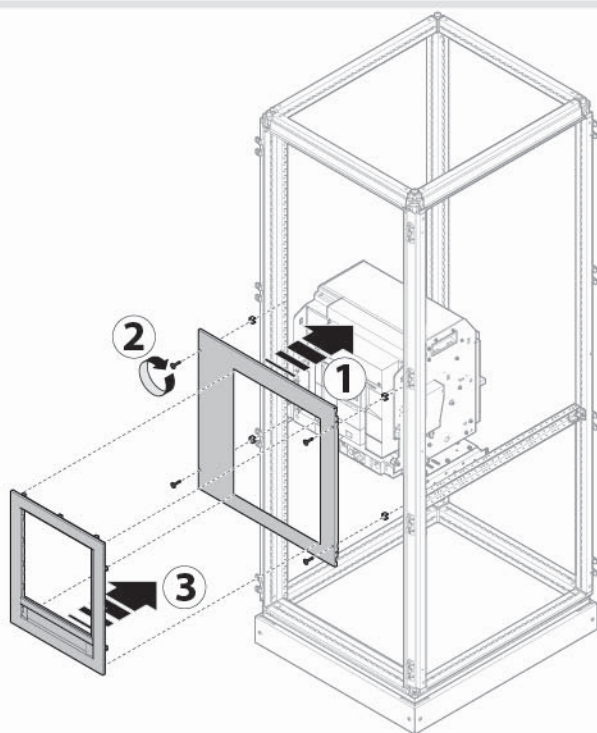


Version	HW1	HW2	HW4	Item
Fix	x			HWY280H
DW	x			HWY281H
Fix		x		HWY284H
DW		x		HWY285H
Fix			x	HWY288H
DW			x	HWY289H

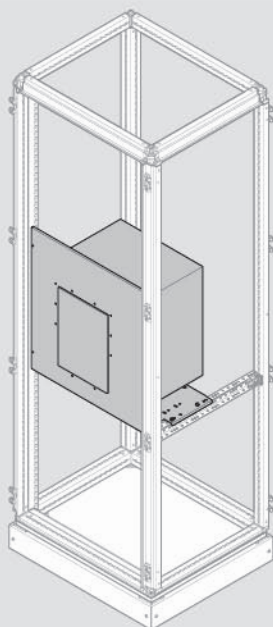



	Device	W
	<b>HWT</b>	
UC766HWT	ACB HWT kit 2000 A	600
UC786HWT	ACB HWT kit 2000 A	800
UC886HWT	ACB HWT kit 4000 A	800
	<b>HW</b>	
UC766HW	ACB HW kit 2000 A	600
UC886HW	ACB HW kit 4000 A	800

	H1
UC1800F	1800
UC2000F	2000

	D
UC500FU	600
UC700FU	800

