



6LE000638A

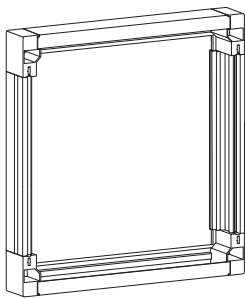

- | | | |
|------|-------------------------------|-----------------------|
| (FR) | Rehausse pour tableau | Notice d'instructions |
| (EN) | Elevation set for enclosure | User instructions |
| (DE) | Erhöhungsrahmen für Verteiler | Bedienungsanleitung |
| (ES) | Realce para caja | Instrucciones de uso |
| (PT) | Sobrelevação para caixa | Instruções |
| (SV) | Förhöjningsats för kapsling | Bruksanvisning |
| (NL) | Verhoogsystemen | Gebbruiksaanwijzing |

Gamma 18

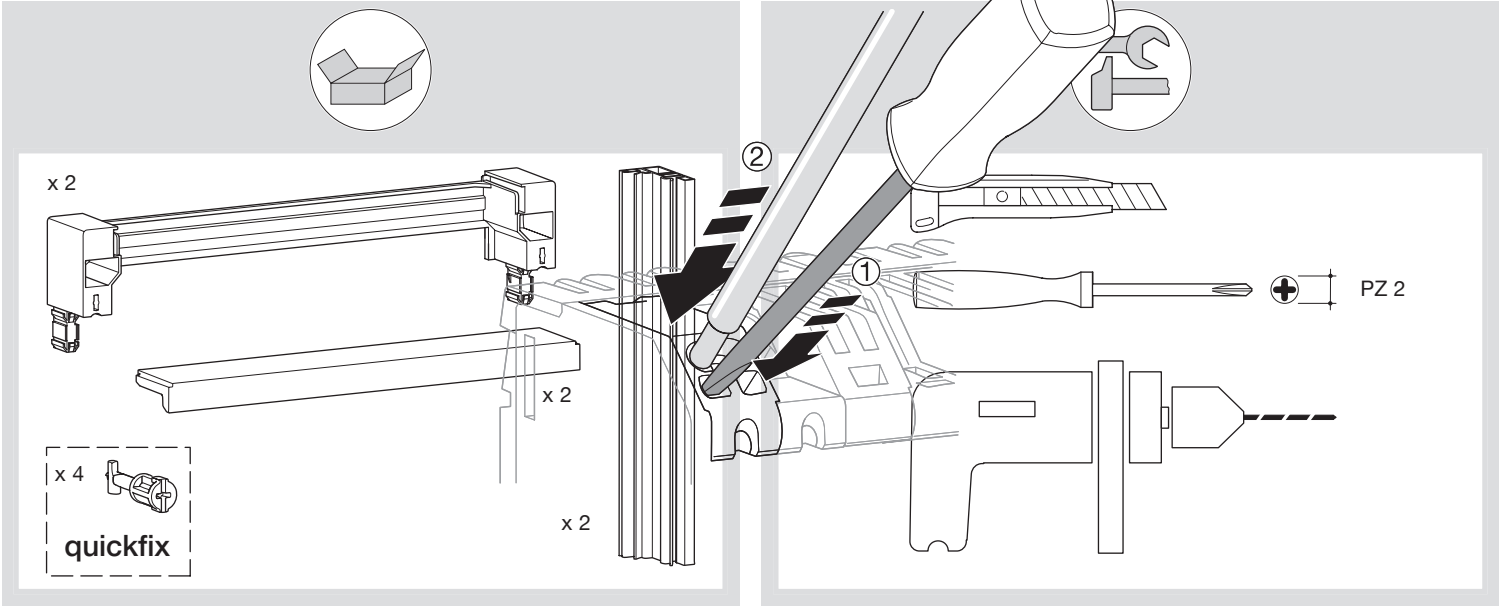

355 mm

330 mm

A F

				A (mm)	F (mm)
GR118AN	GD118.		GS118A	250	190
GR218AN	GD218.		GS218A	375	315
GR318AN	GD318.	GD018A +GD118.	GS318A	500	440
GR418AN	GD418.	GD018A +GD218.	GS418A	625	565
GR318CN		GD018A +GD318.		750	690
GR418CN		GD018A +GD418.		875	815

