

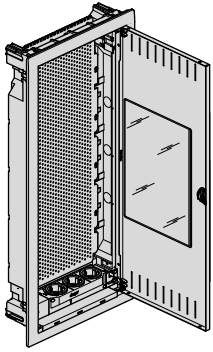
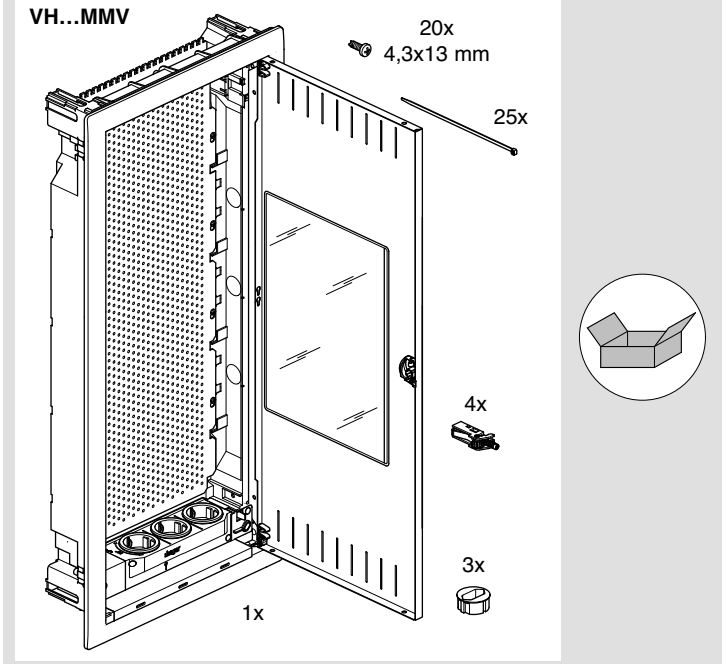


6LE000653C

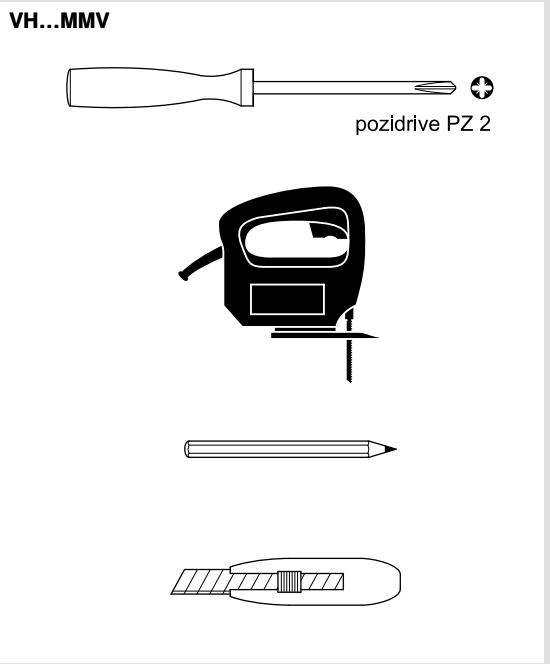

Volta
VH...MMV; VU...MMV
VH...WWV; VU...WWV

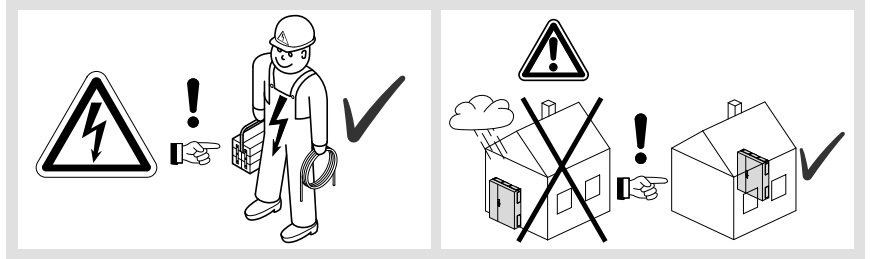

VH...MMV


max. 40 mm

B


H

	B	H
VH48MMV	314 mm	721 mm
VH60MMV	314 mm	846 mm


VH...MMV

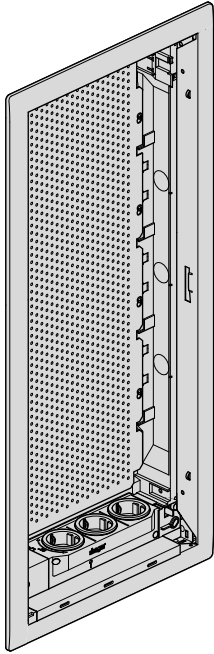


VH...MMV

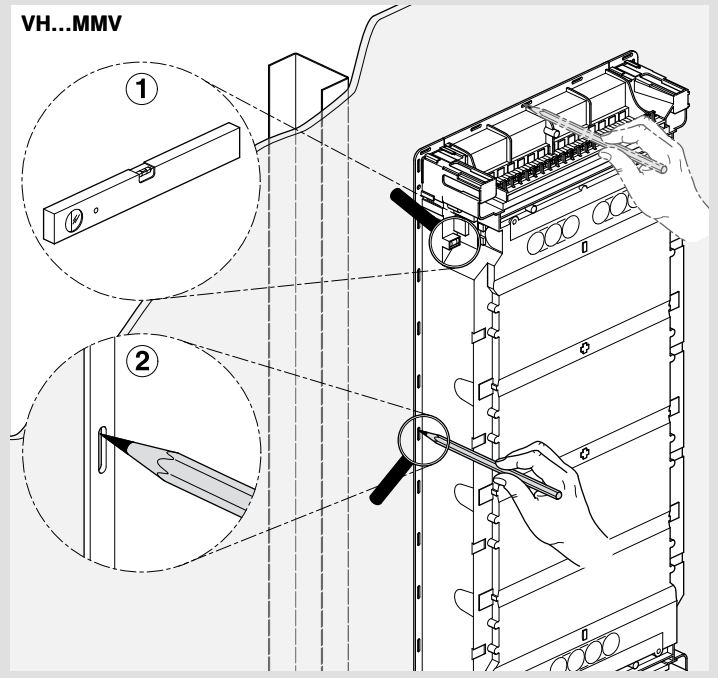


VH...MMV

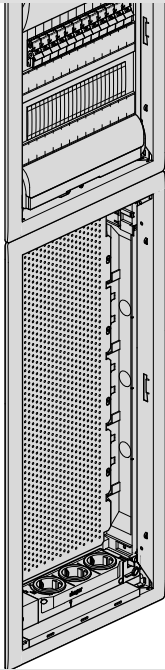


VH...MMV

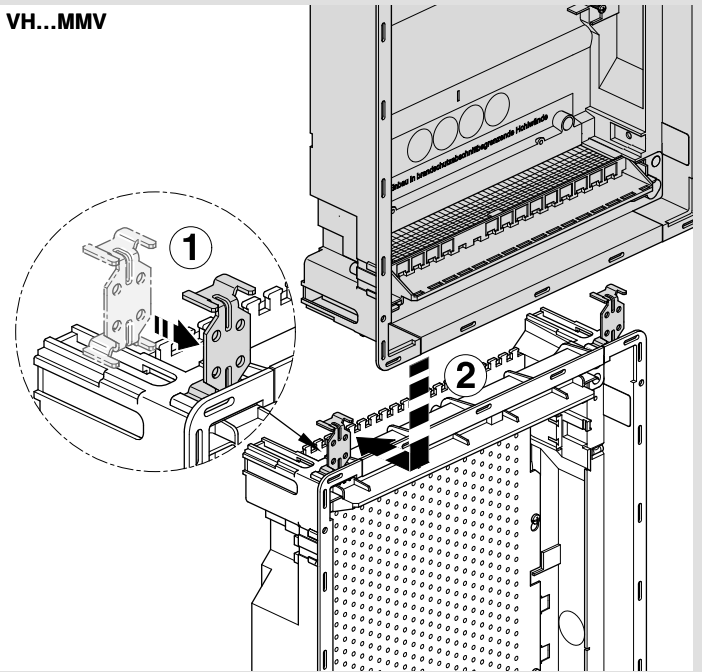


VH...MMV

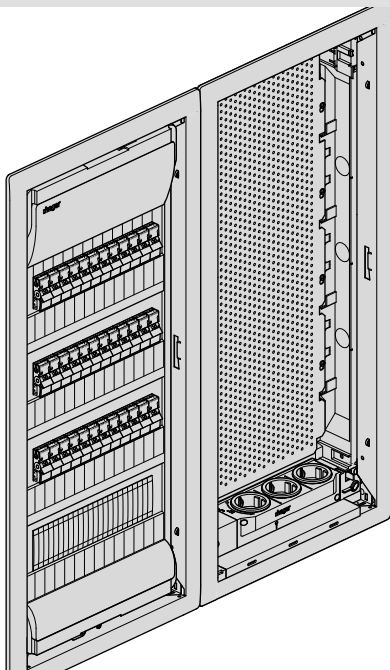


VH...MMV

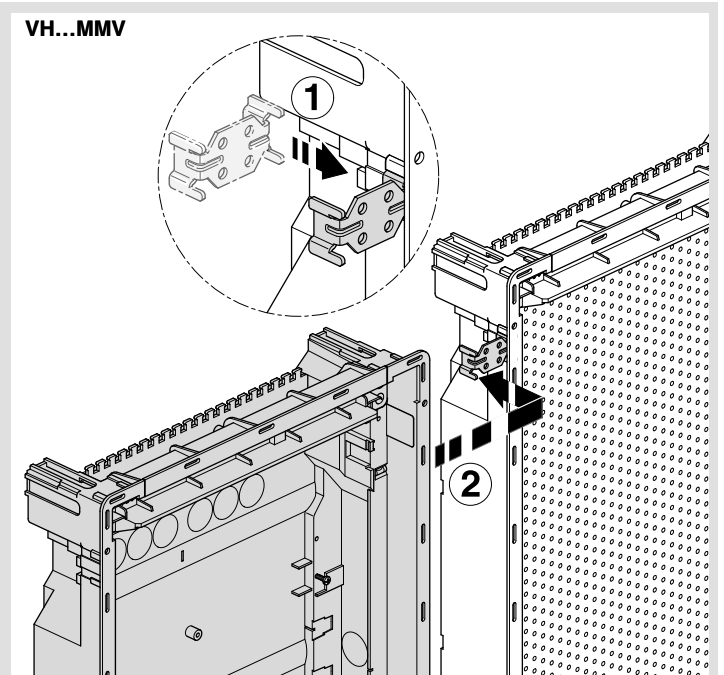


VH...MMV

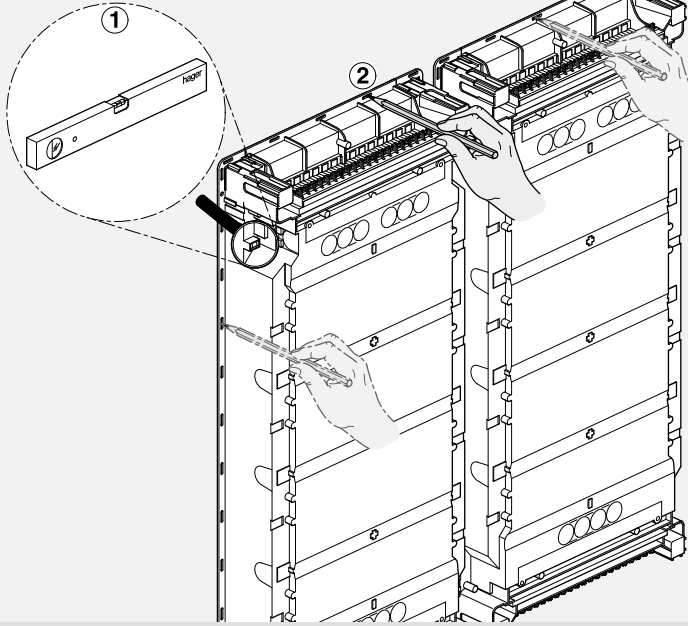


VH...MMV

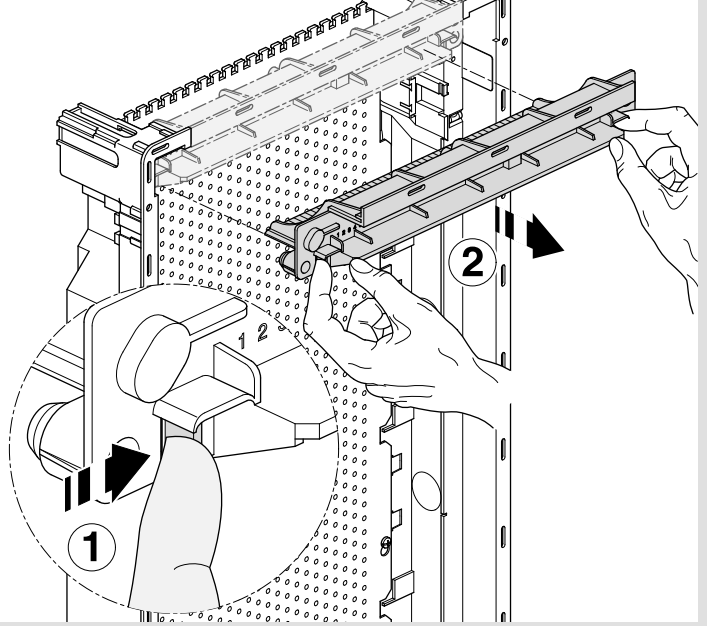


VH...MMV

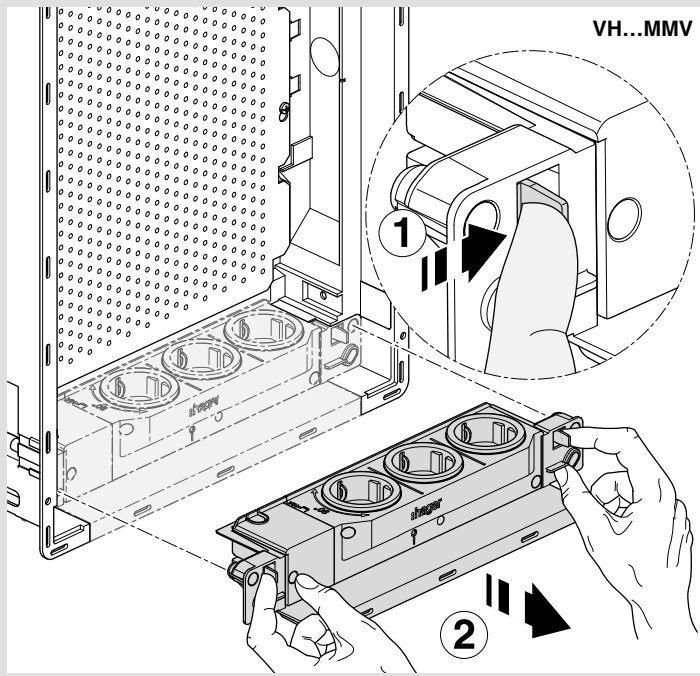


VH...MMV

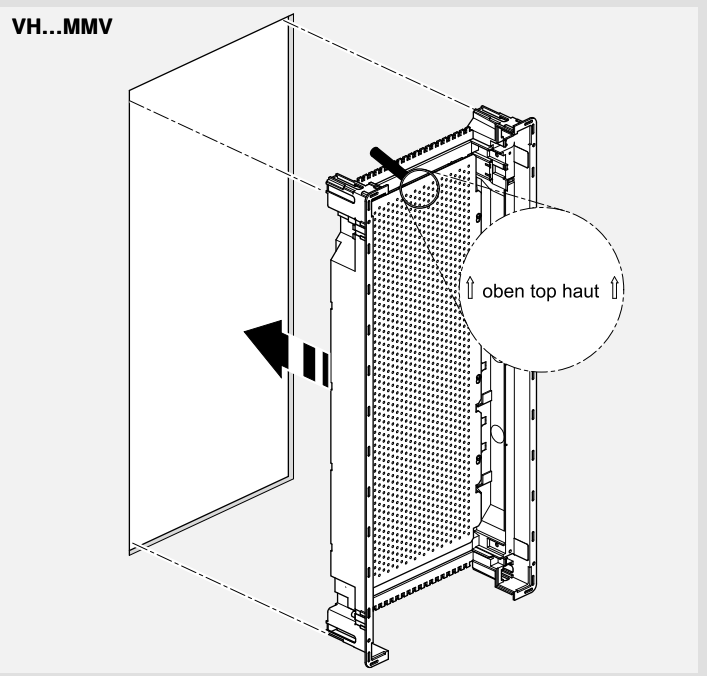




VH...MMV

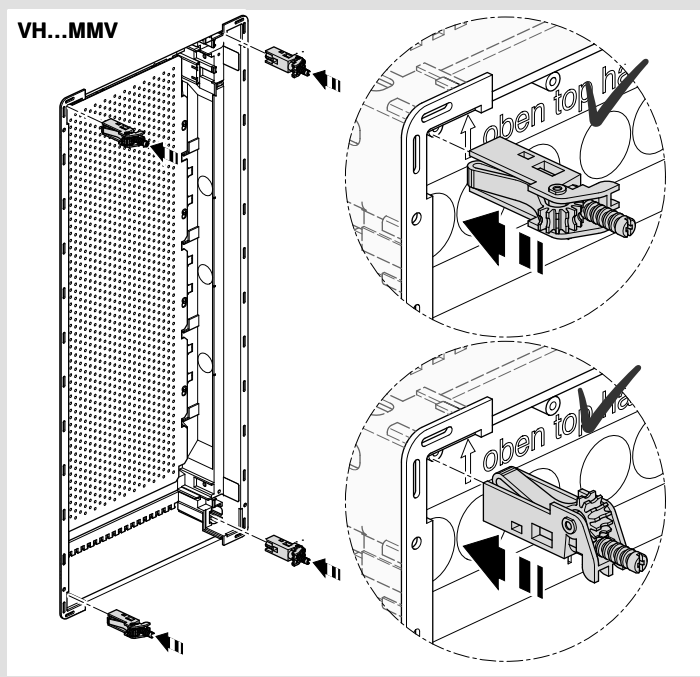


VH...MMV

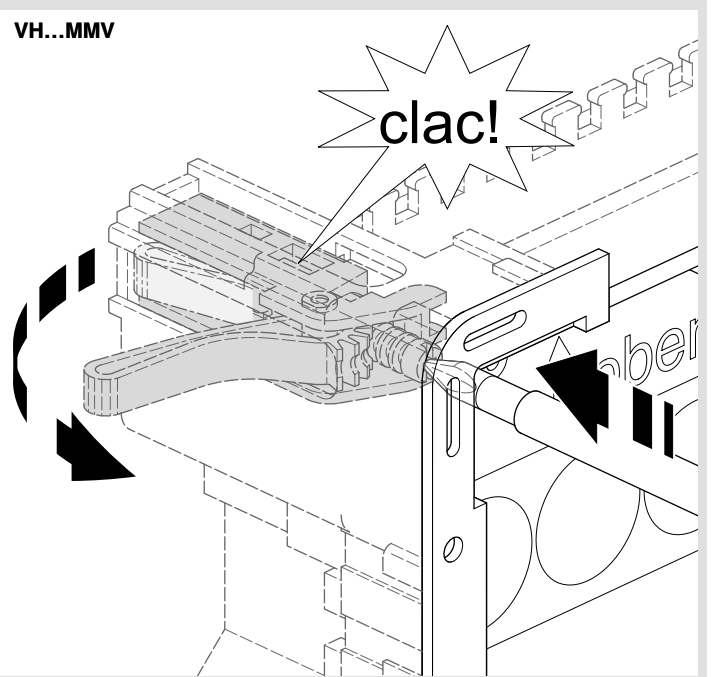


VU...MMV

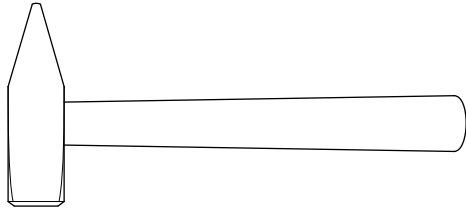  

VU...MMV

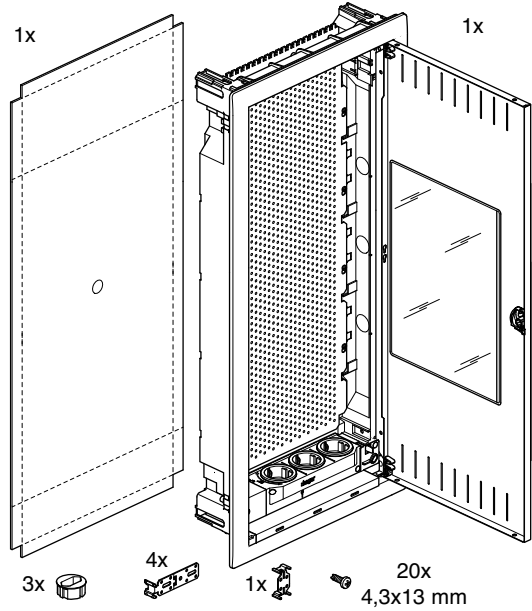


VU...MMV

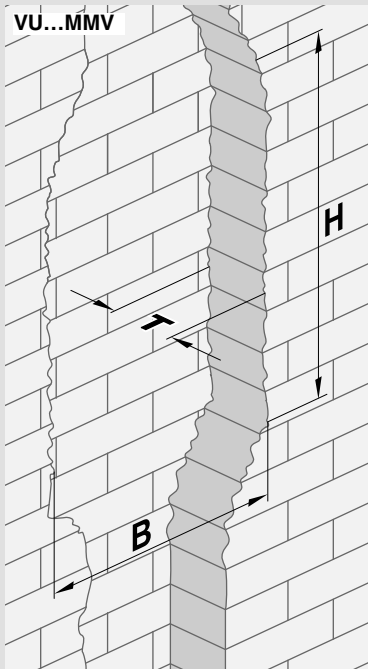


	B (mm)	H (mm)	T (mm)
VU48MMV	335	740	90
VU60MMV	335	865	90


VU...MMV






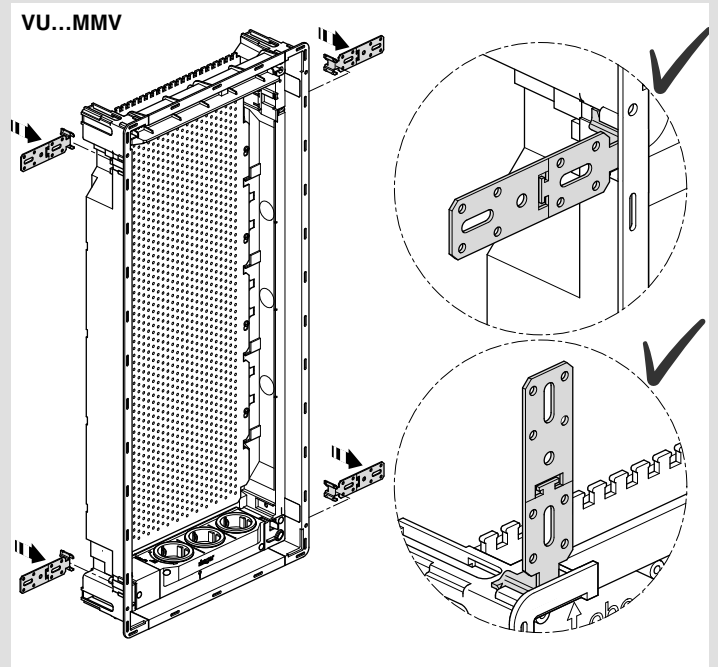


VU...MMV

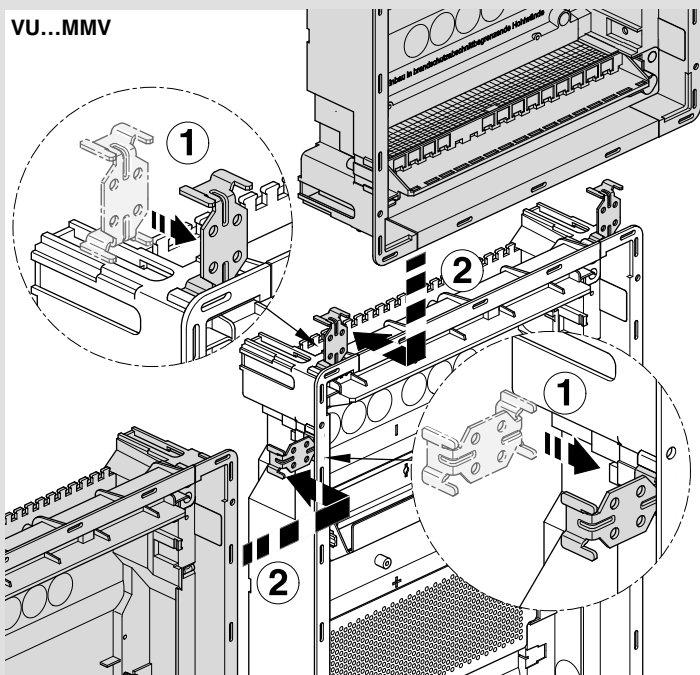


VU...MMV

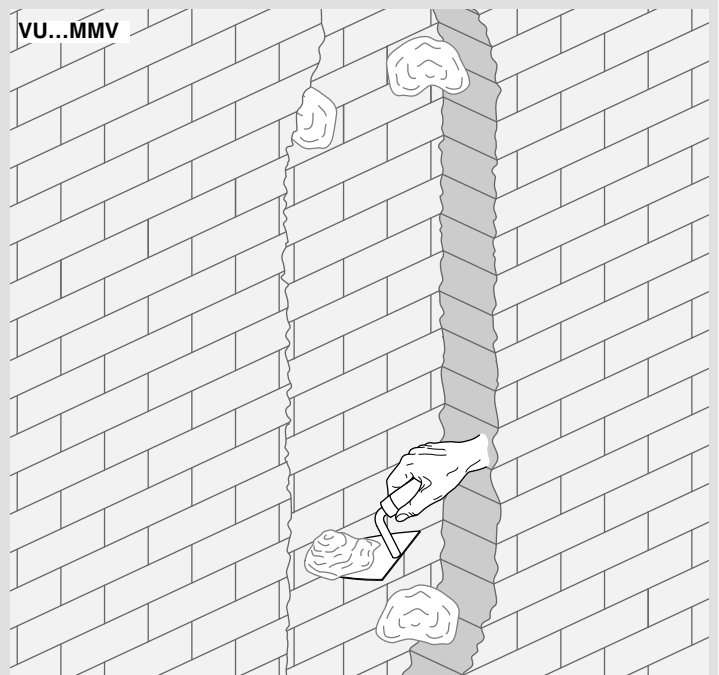


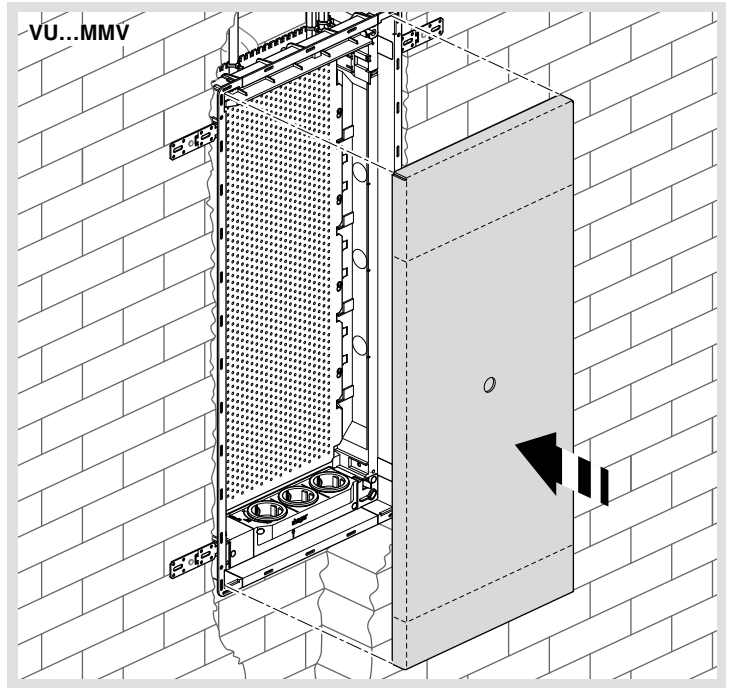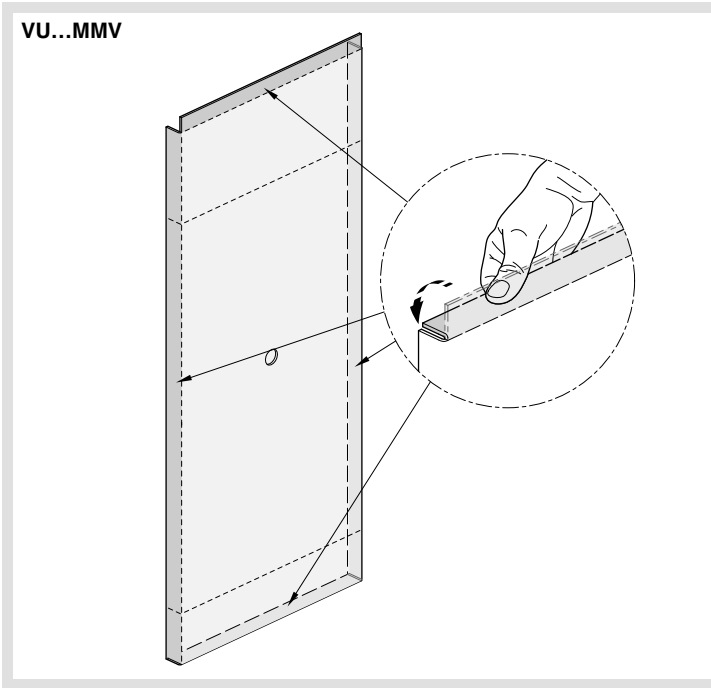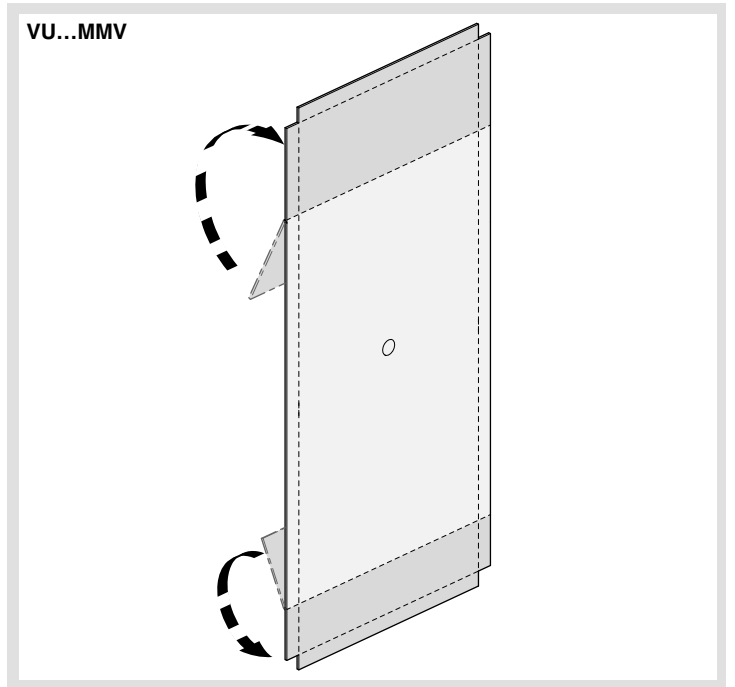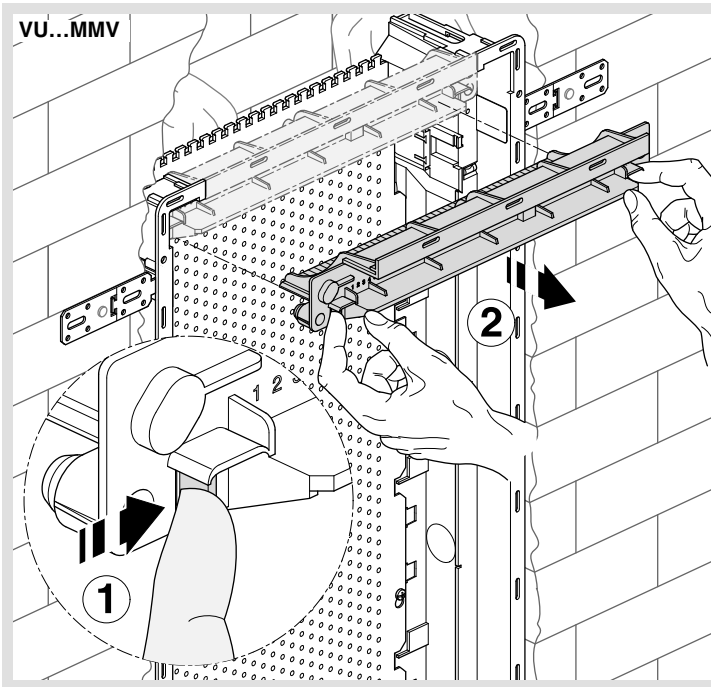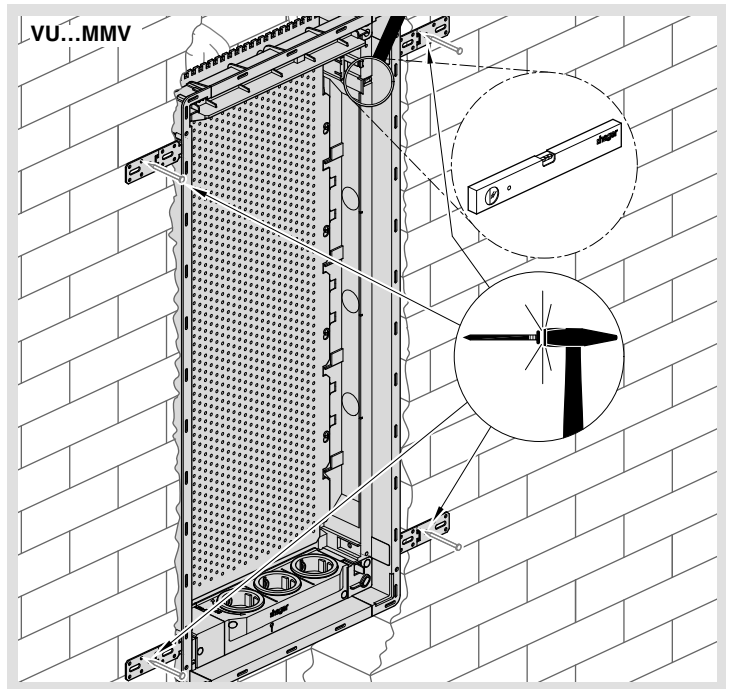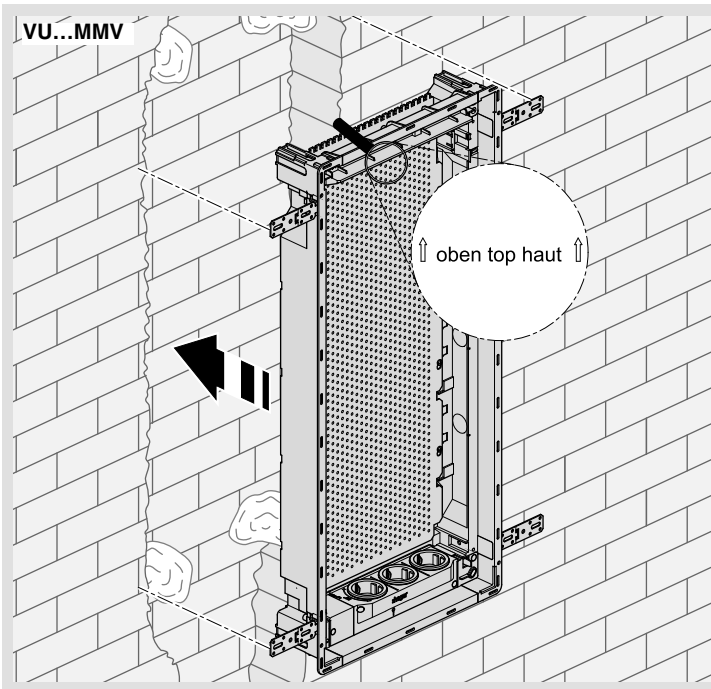





VU...MMV






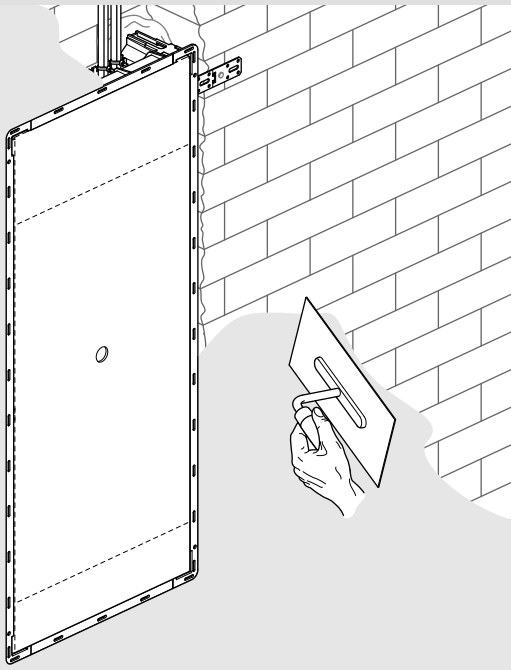






VH...MMV

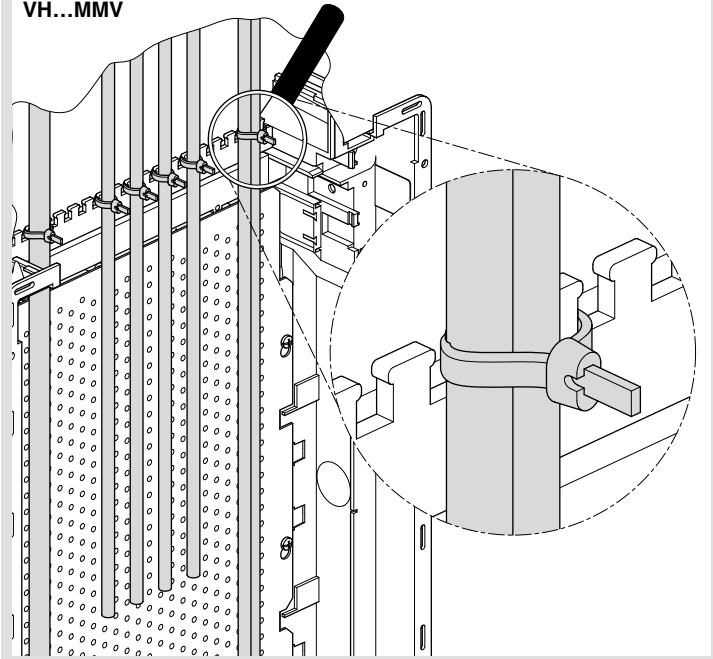

VH...MMV

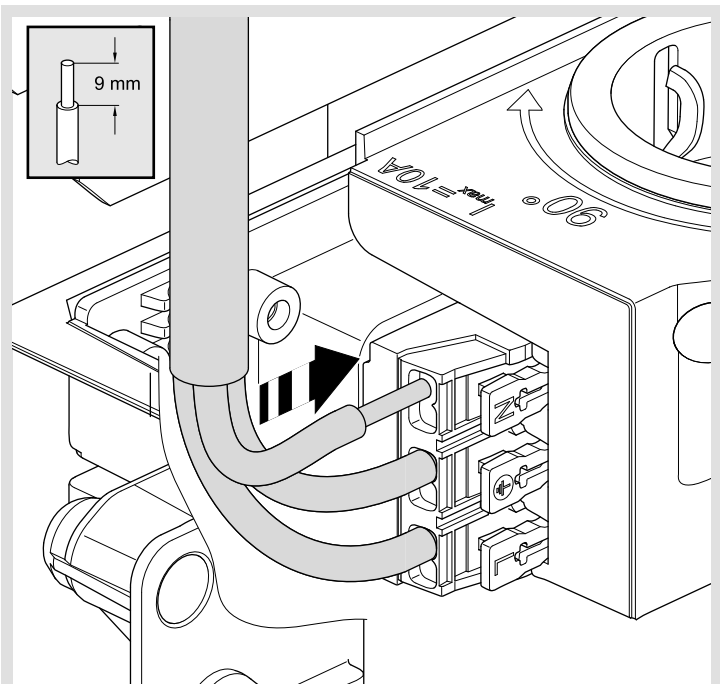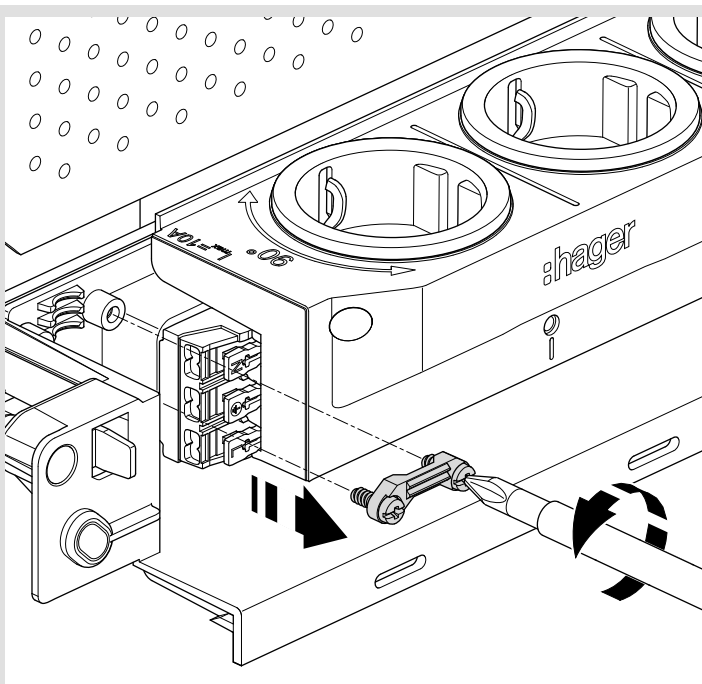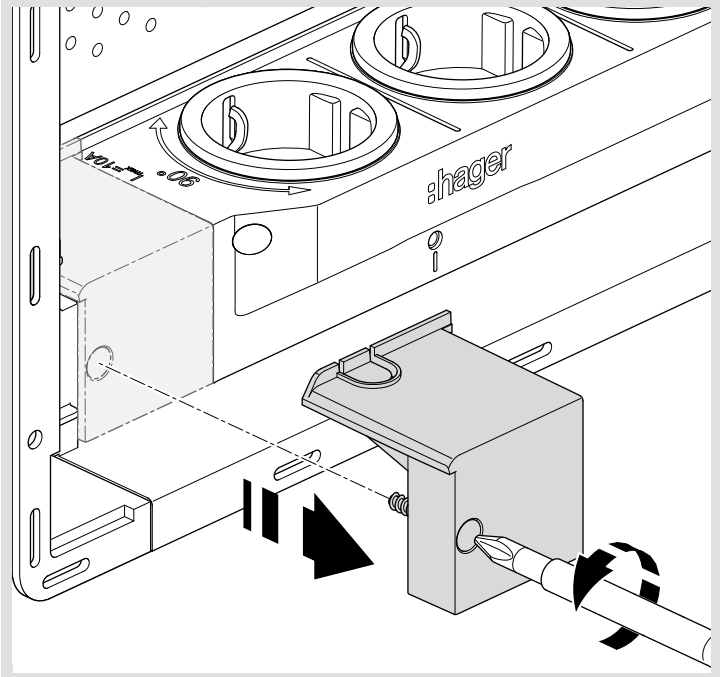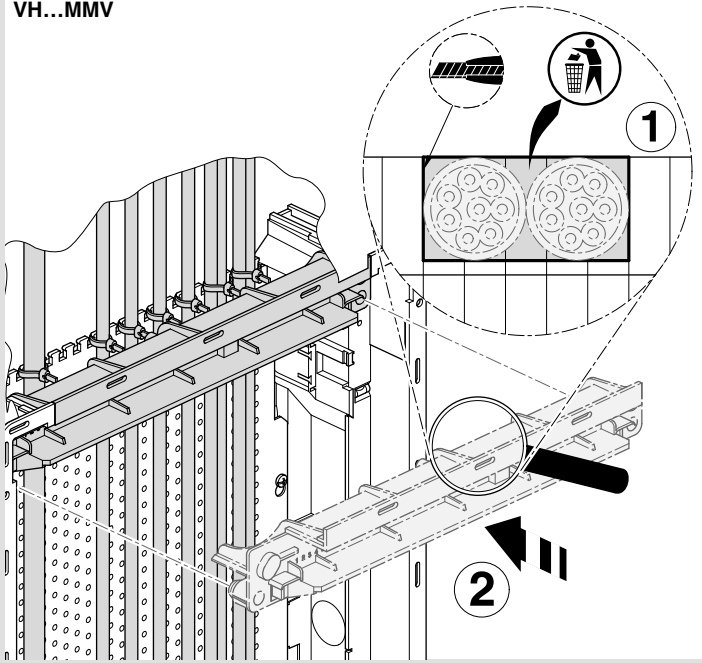

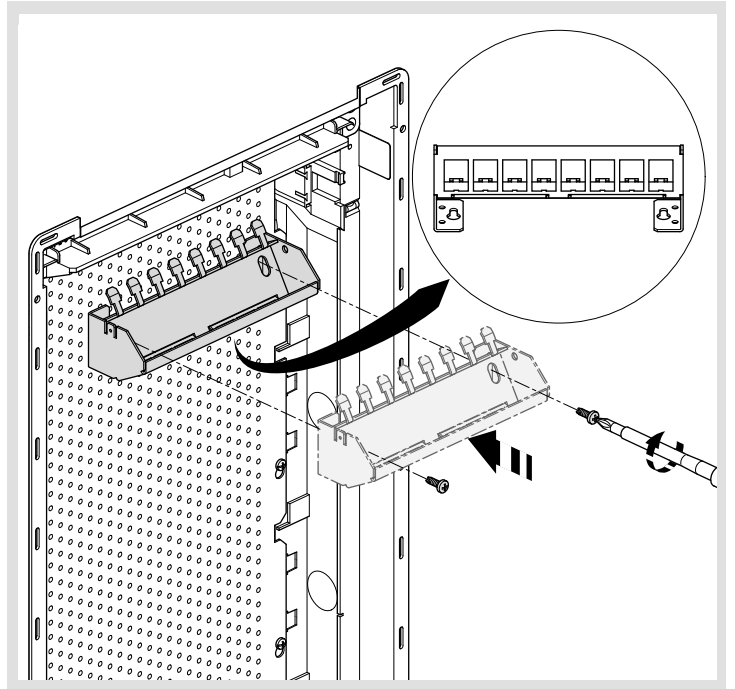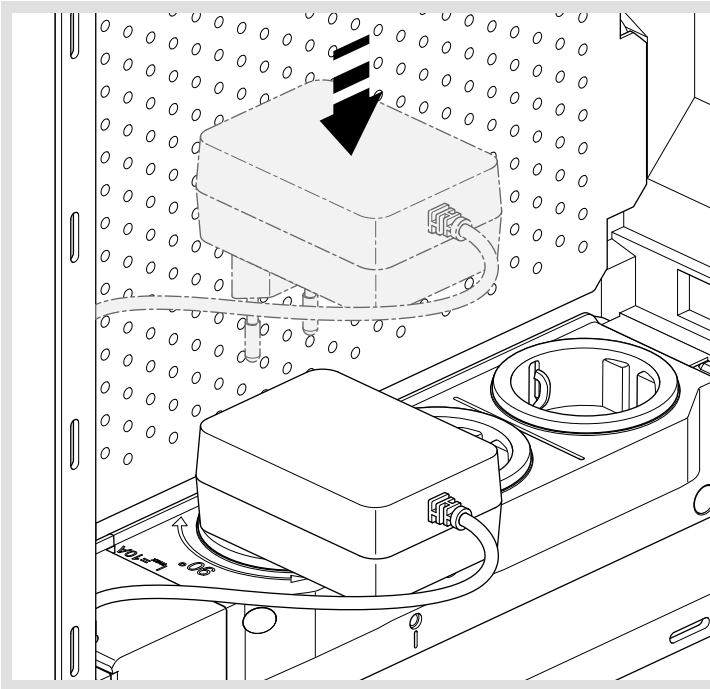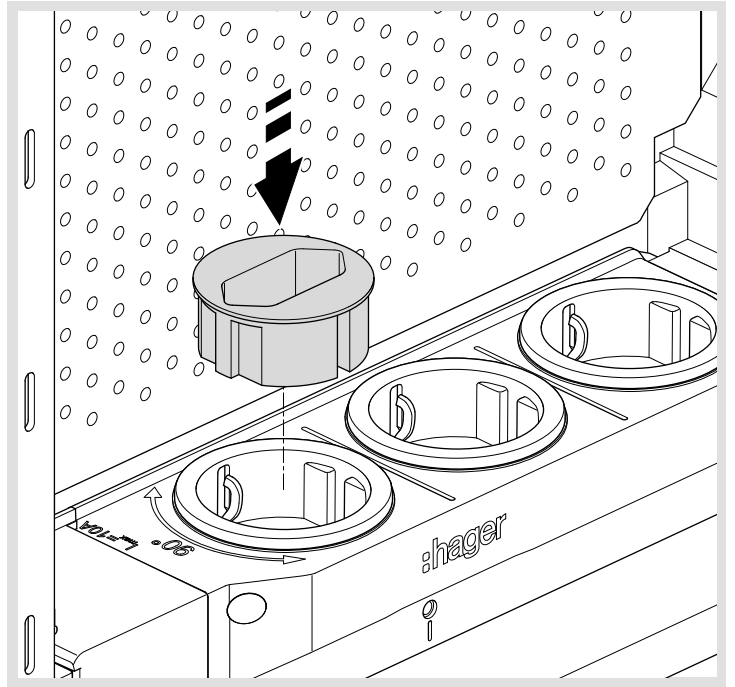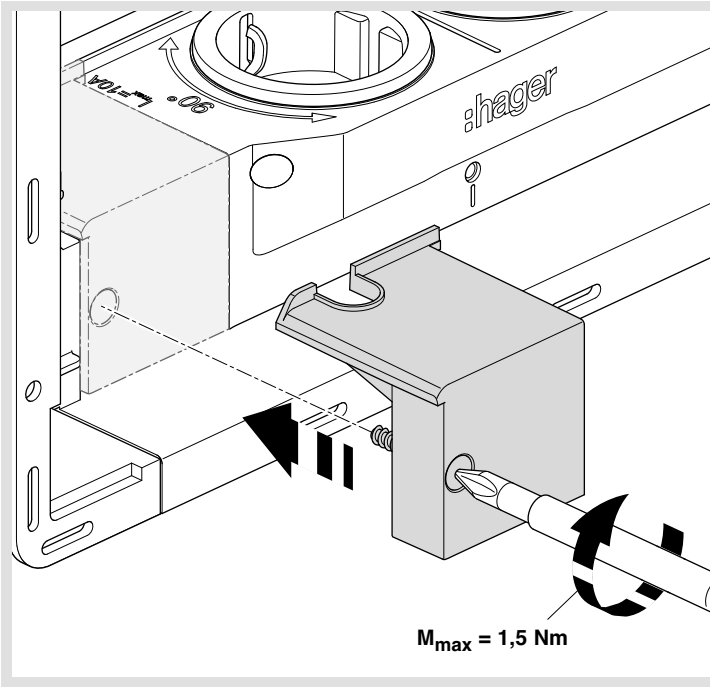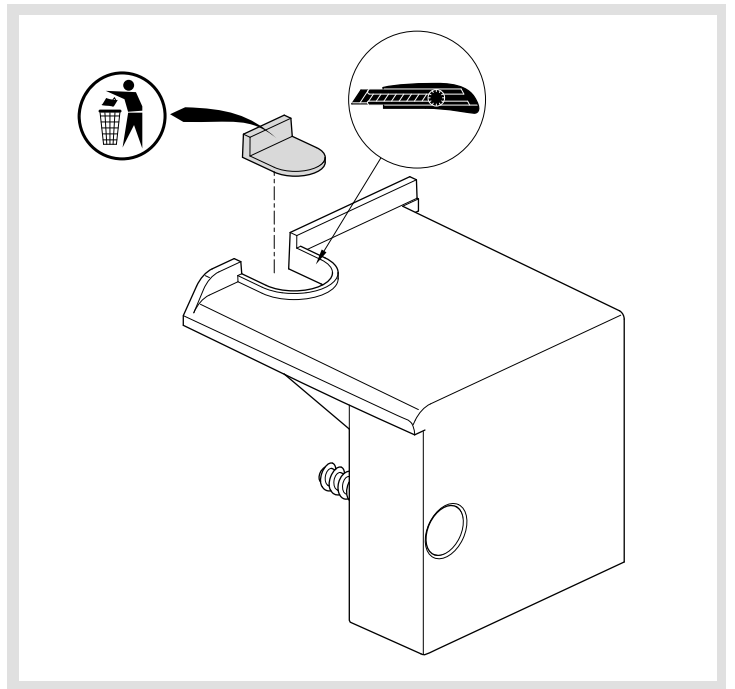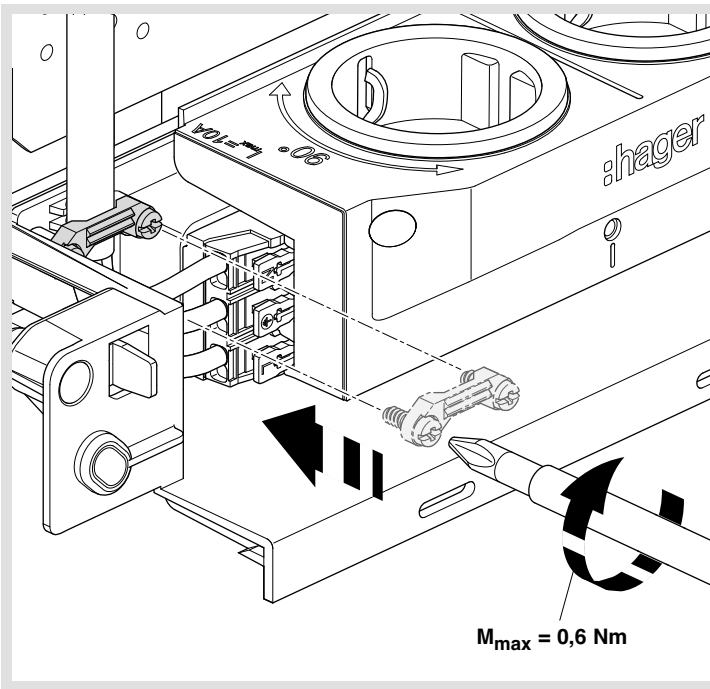

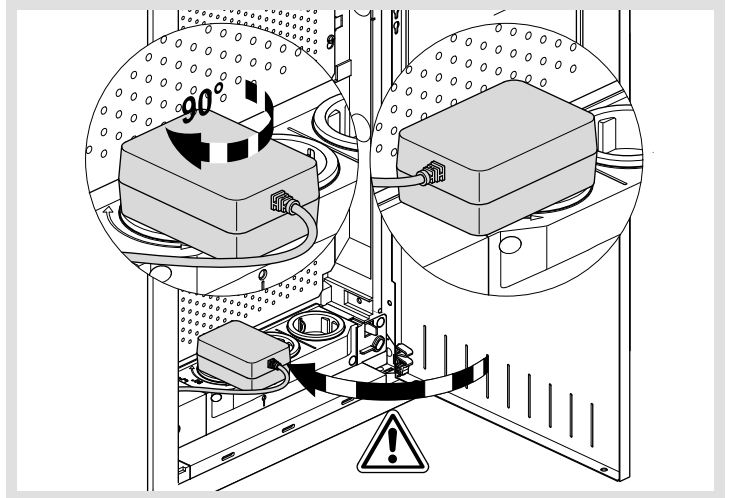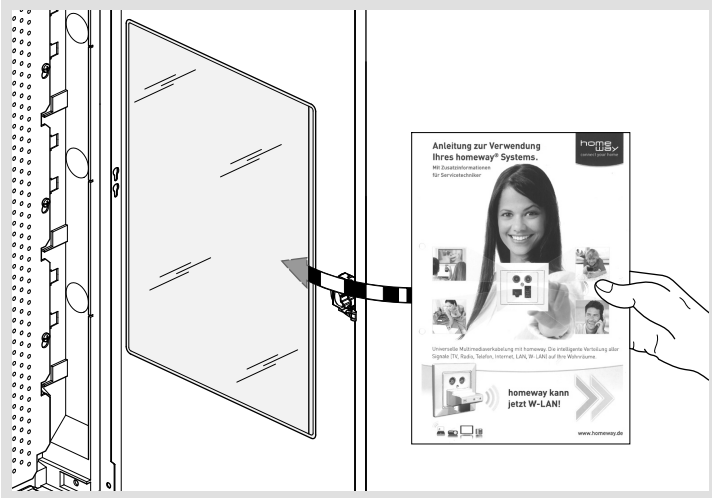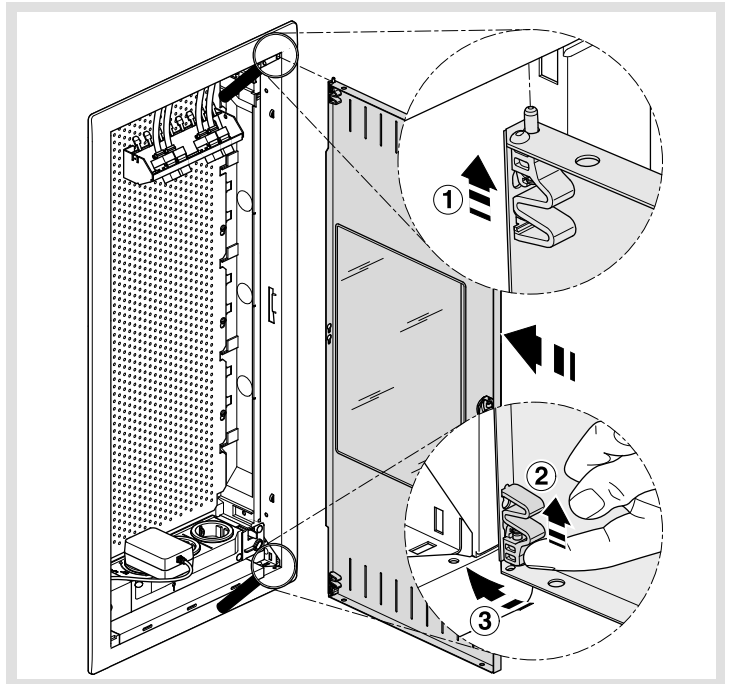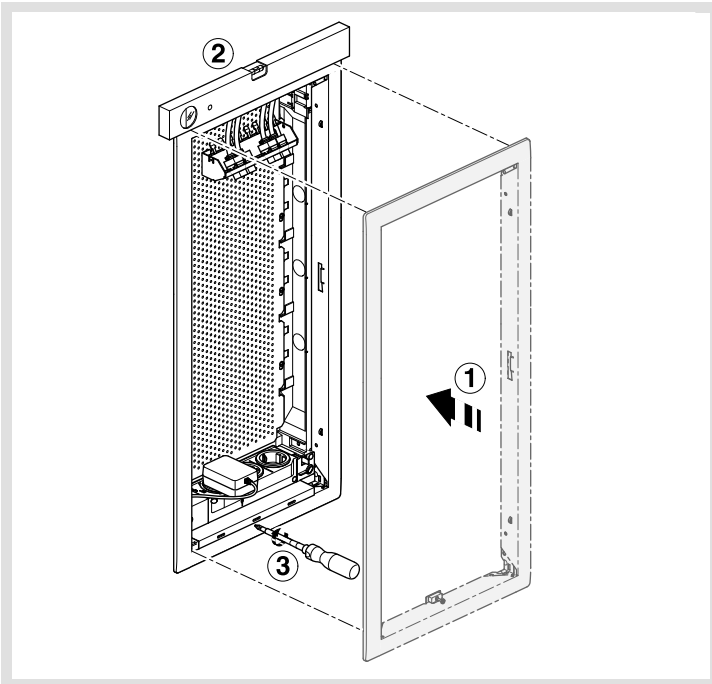

Zubehör

