

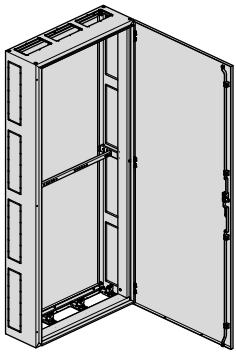
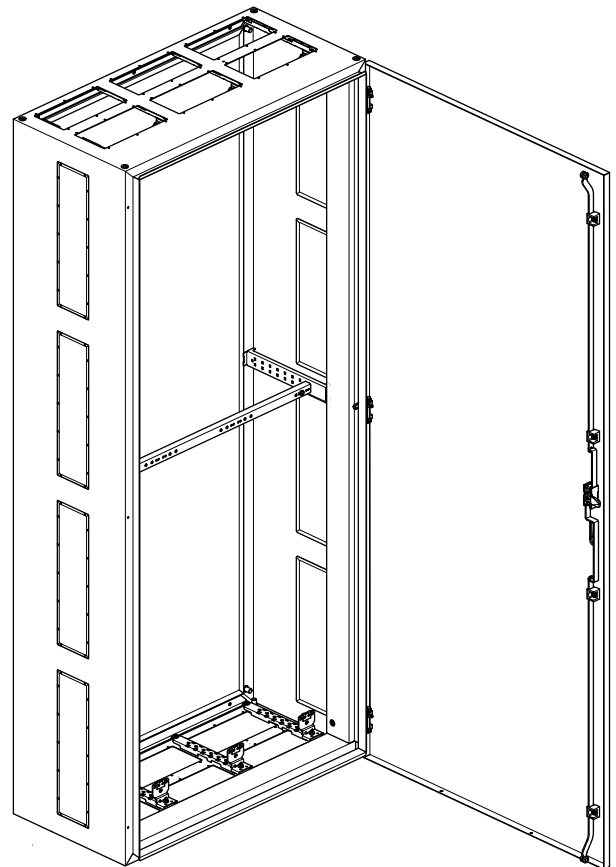
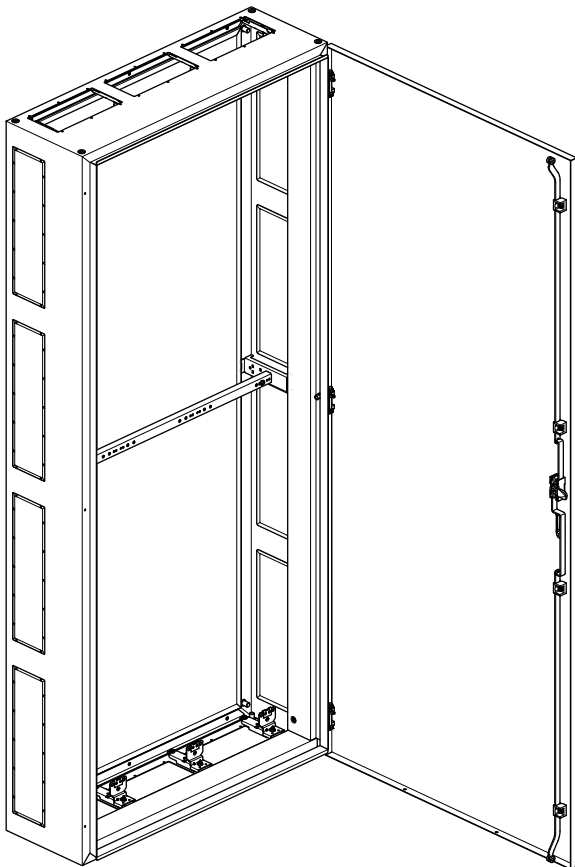
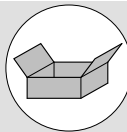


6LE003350C

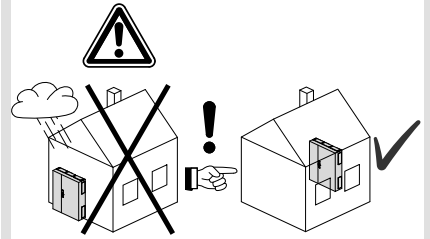


## univers IP41

- |    |                          |    |                        |
|----|--------------------------|----|------------------------|
| ⓁⒺ | Montageanleitung         | ⓁⒻ | Upute za montažu       |
| ⓁⒻ | Notice d'instructions    | ⓁⒼ | Szerelési útmutató     |
| ⓁⒼ | Mounting instructions    | ⓁⓉ | Montavimo instrukcija  |
| ⓁⓃ | Montage instructie       | ⓁⓋ | Montāžas instrukcija   |
| ⓁⓀ | Monteringsvejledning     | ⓁⓅ | Instrukcja montażowa   |
| ⓁⓂ | Asennusohje              | ⓁⓇ | Intructiuni de montare |
| ⓁⓃ | Montasjeanvisning        | ⓁⓈ | Návod na montáž        |
| ⓁⓊ | Monterings instruktioner | ⓁⓇ | Указания по установке  |
| ⓁⓉ | Istruzioni di montaggio  | ⓁⓇ | Инструкции за монтаж   |
| ⓁⓈ | Instrucciones de montaje | ⓁⓇ | Οδηγίες χώνευσης       |
| ⓁⓉ | Instruções de montagem   | ⓁⓈ | Navodilo za montažo    |
| ⓁⓃ | Montážní návod           | ⓁⓇ | Paigaldusjuhised       |
| ⓁⓇ | Uputstvo za montažu      | ⓁⓈ | Leiðbeiningar          |
| ⓁⓀ | Інструкції з установки   | ⓁⓇ | دليل التركيب           |

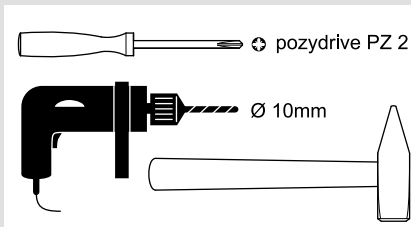


Tiefe / Depth	Höhe / Height	Breite / Width	SK I	X	Y	X1	Y1	Z
275	1850	300	FS21E	245	1871	340	1806	100 / 200
		550	FS22E	495	1871	590	1806	100 / 200
		800	FS23E	745	1871	840	1806	100 / 200
		1050	FS24E	995	1871	1090	1806	100 / 200
		1300	FS25E	1245	1871	1340	1806	100 / 200
400	1850	300	FS21G	245	1871	340	1806	100 / 200
		550	FS22G	495	1871	590	1806	100 / 200
		800	FS23G	745	1871	840	1806	100 / 200
		1050	FS24G	995	1871	1090	1806	100 / 200
		1300	FS25G	1245	1871	1340	1806	100 / 200

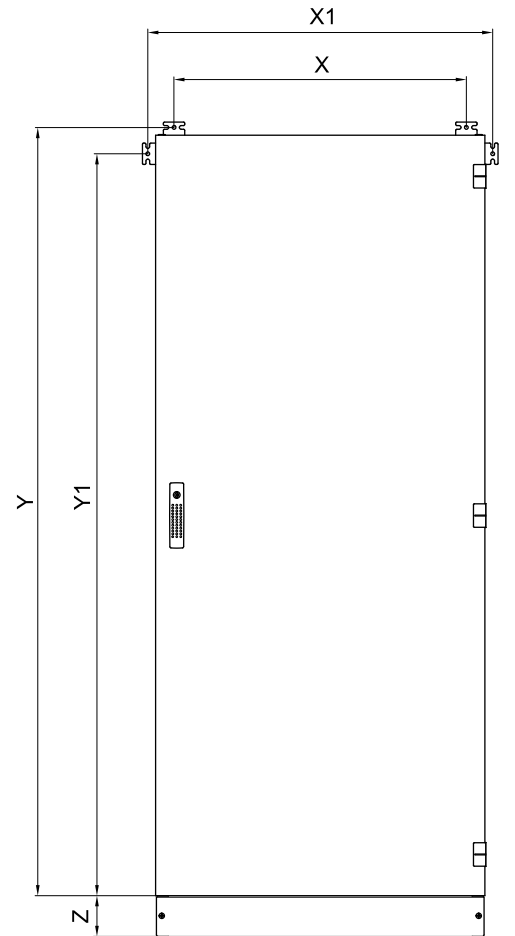


01

W Breite/ Width	D Tiefe/ Depth	H Höhe / Height		A	B
302	250	100	200	272	150
552	250	100	200	522	150
802	250	100	200	772	150
1052	250	100	200	1022	150
1302	250	100	200	1272	150
1552	250	100	200	1522	150


W Breite/ Width	D Tiefe/ Depth	H Höhe / Height		A	B
302	375	100	200	272	150
552	375	100	200	522	150
802	375	100	200	772	150
1052	375	100	200	1022	150
1302	375	100	200	1272	150
1552	375	100	200	1522	150

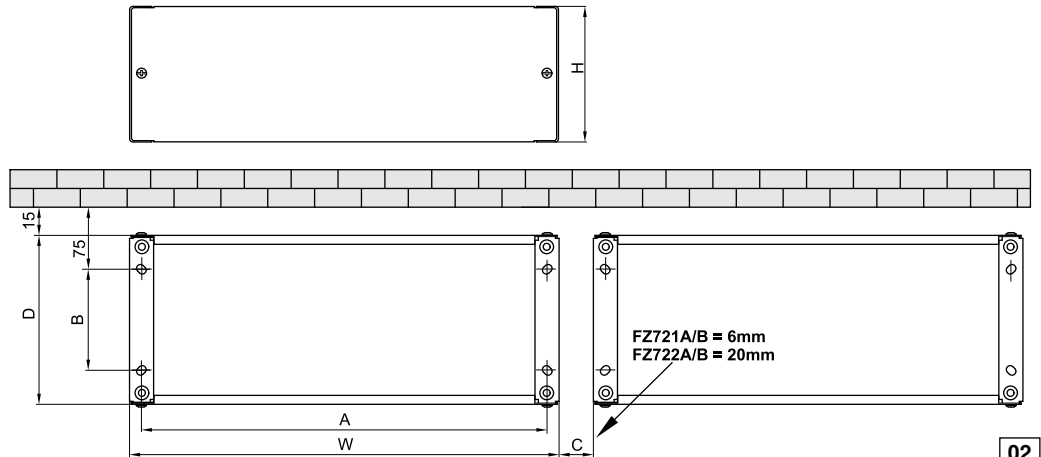


02

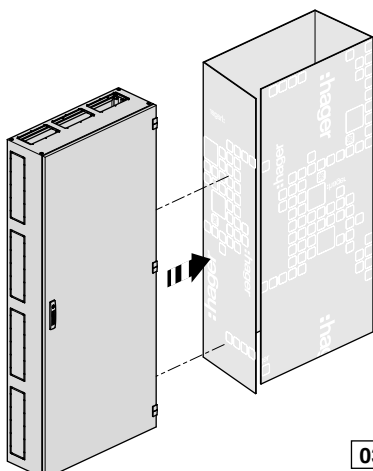










03










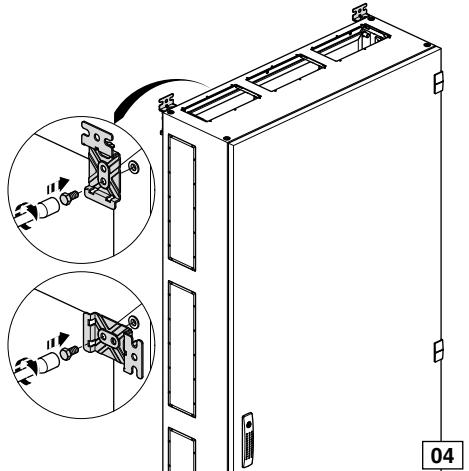











04







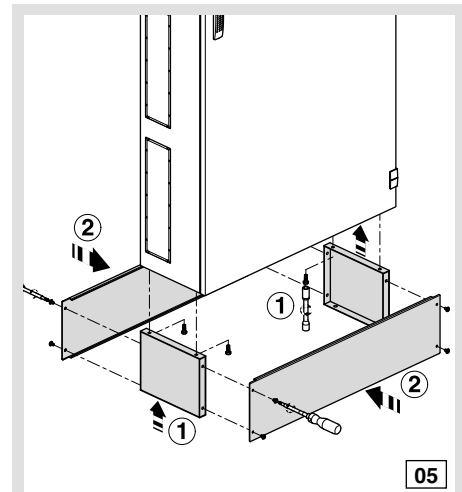


05

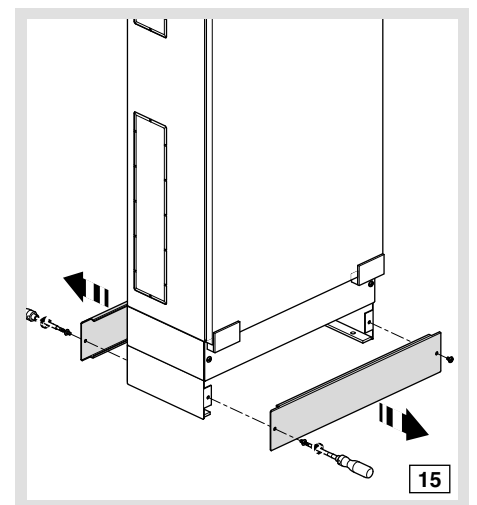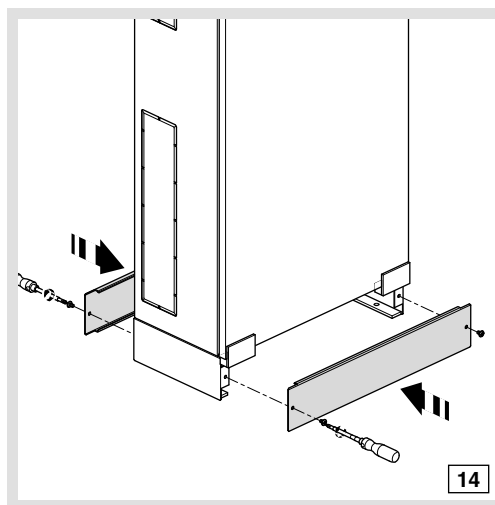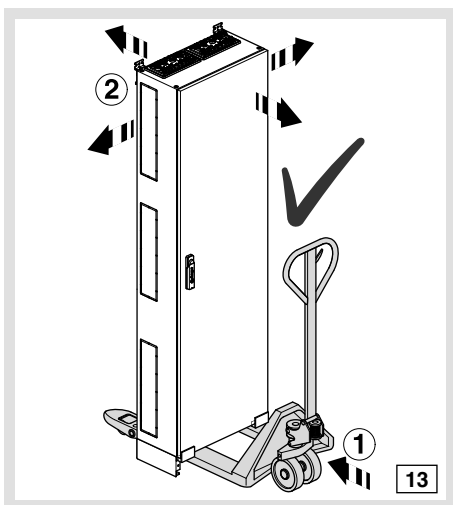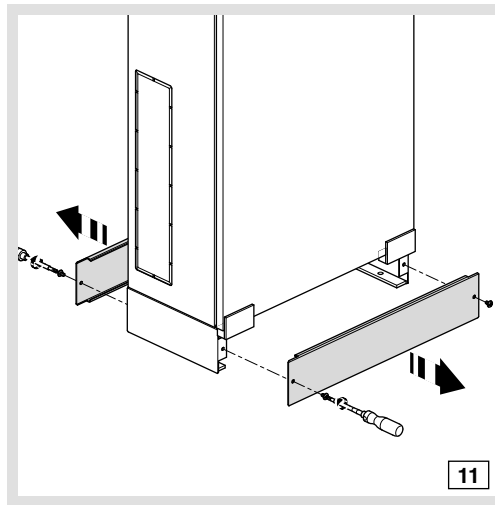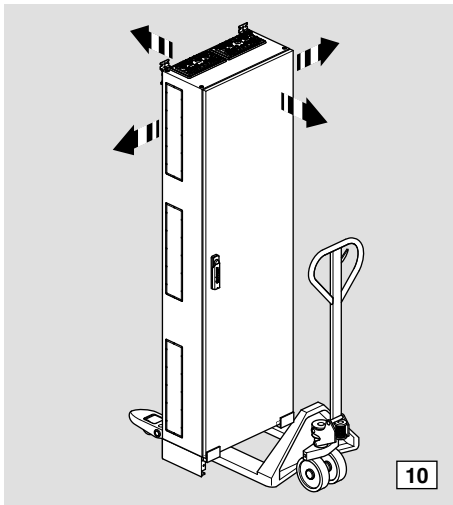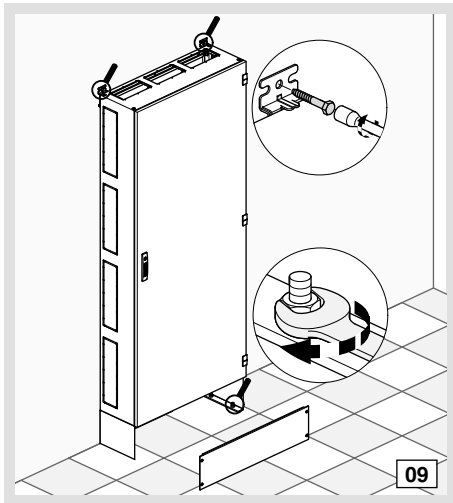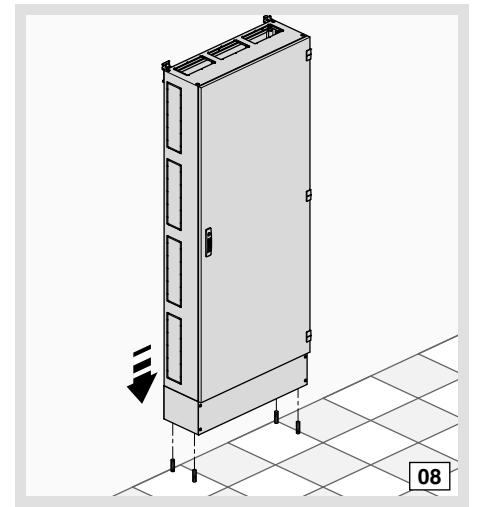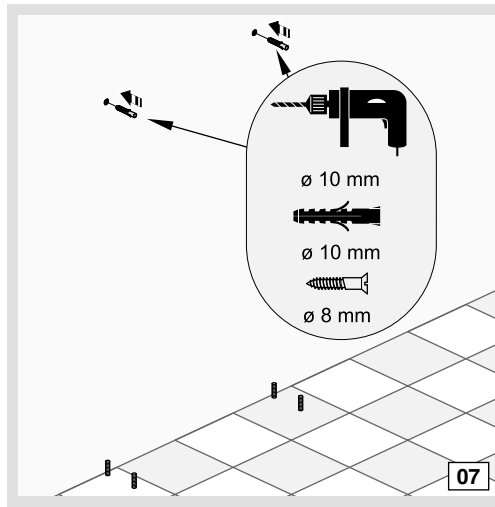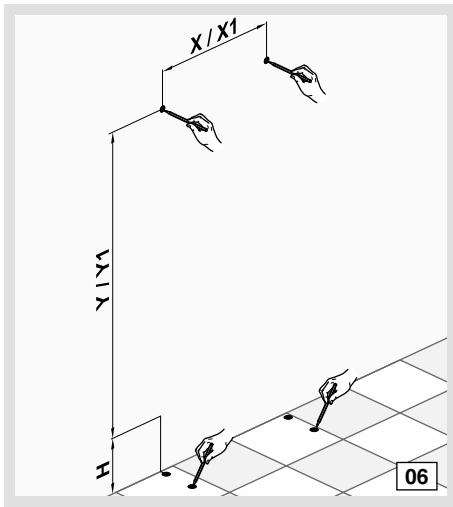


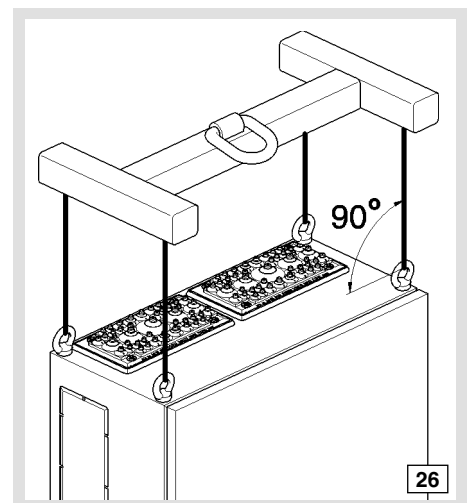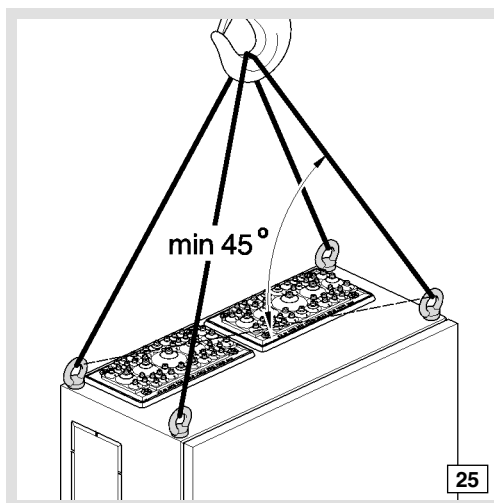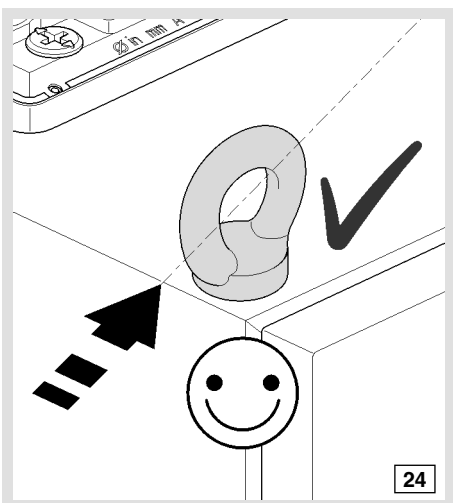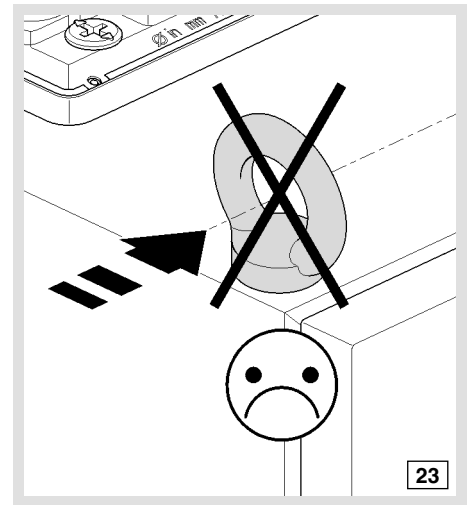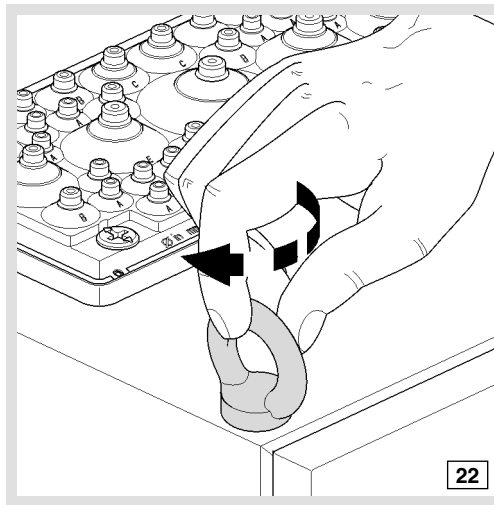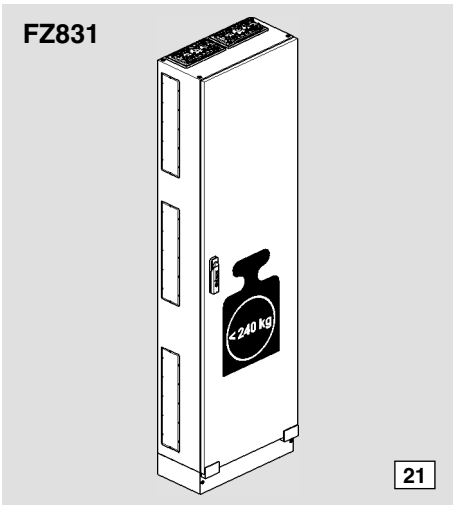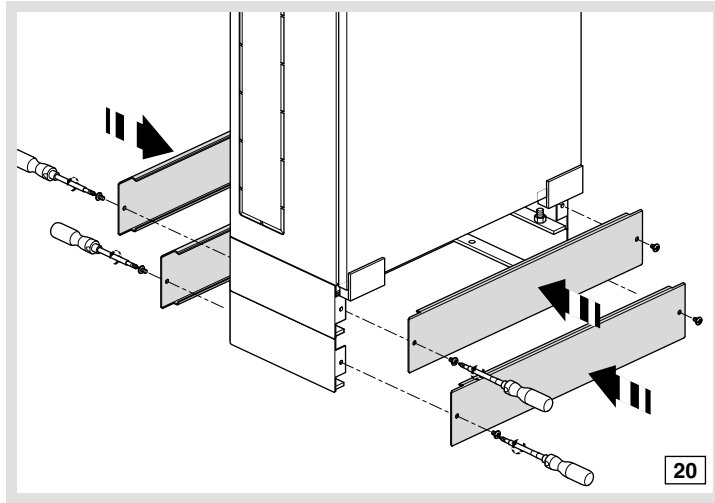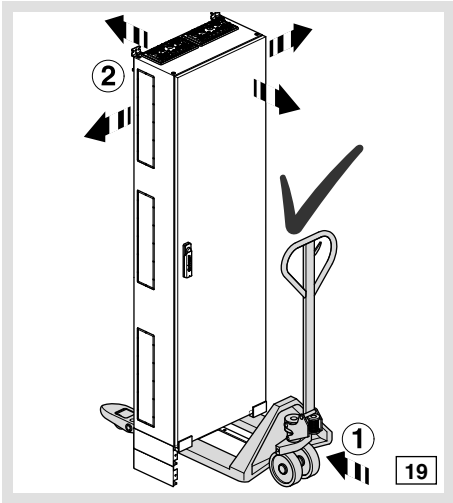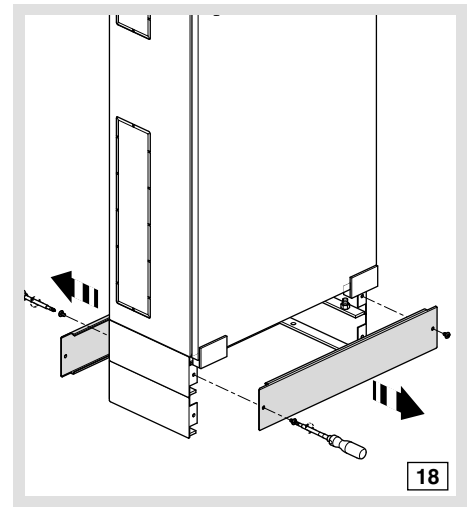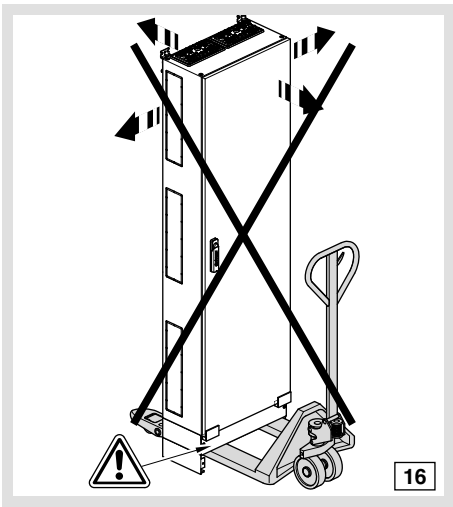

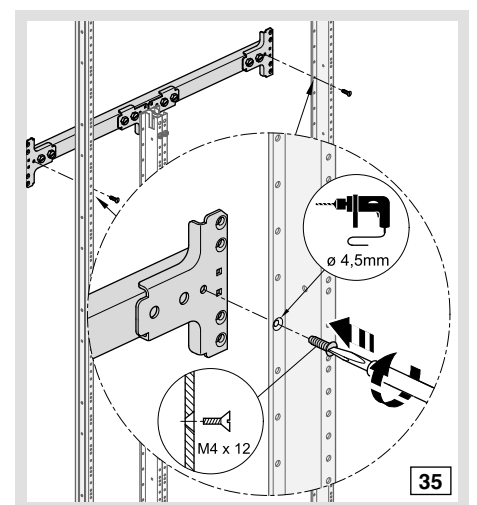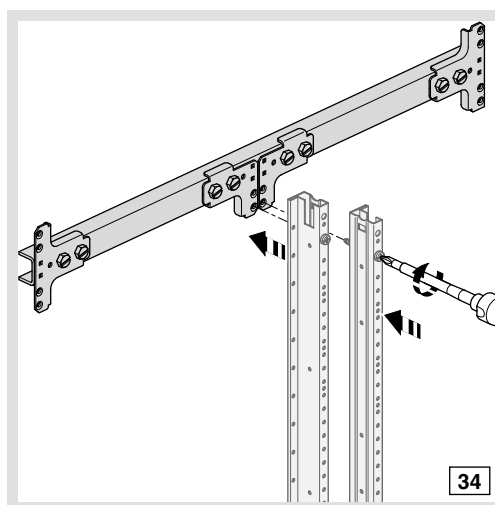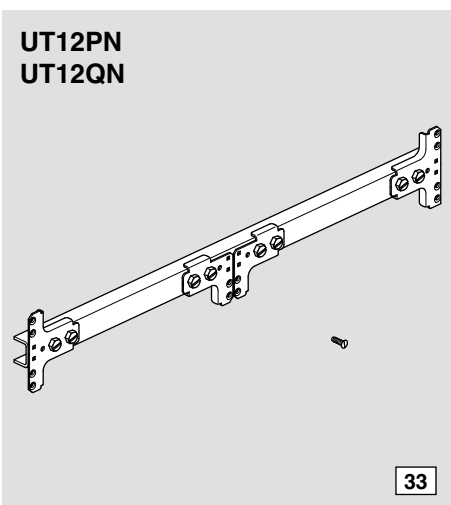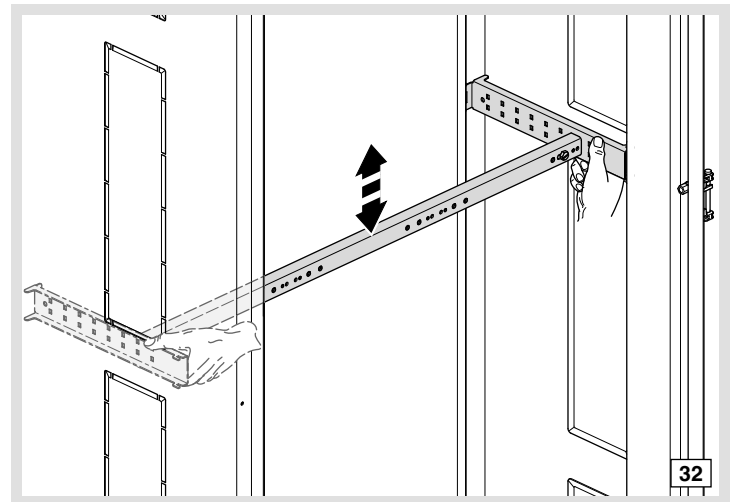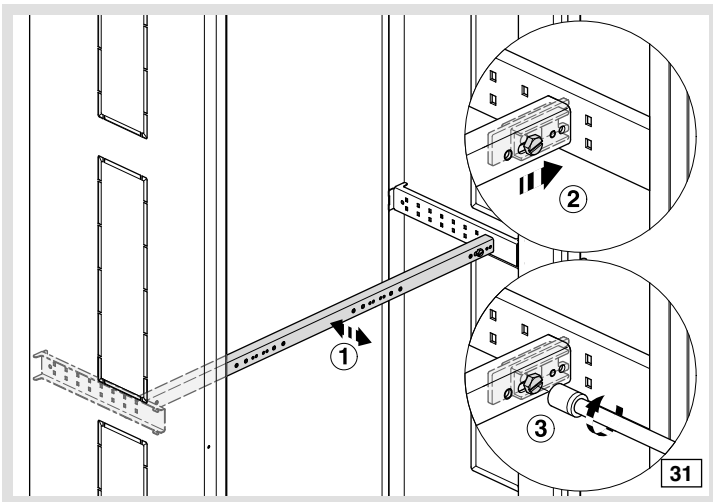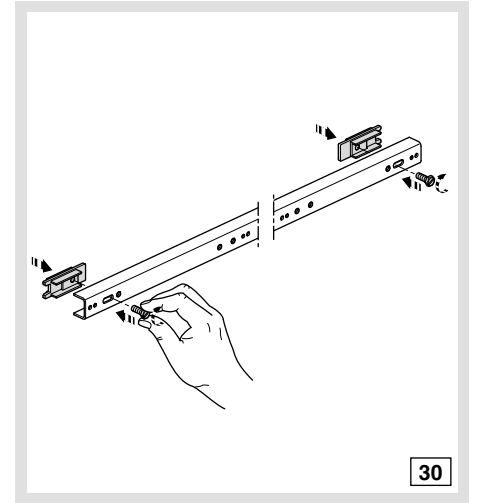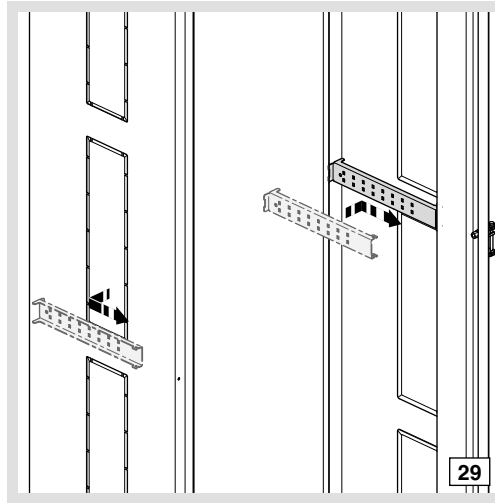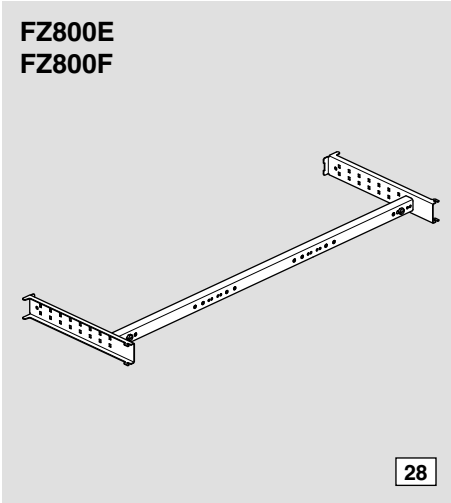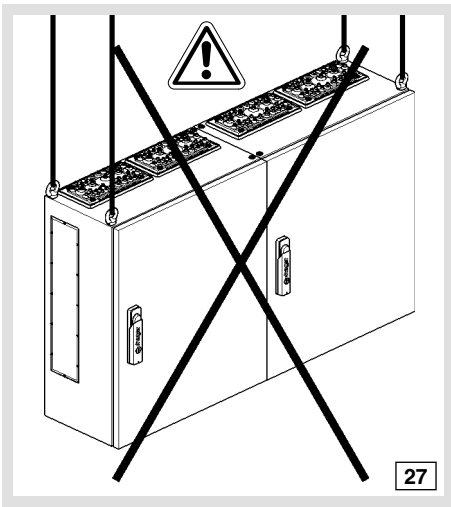


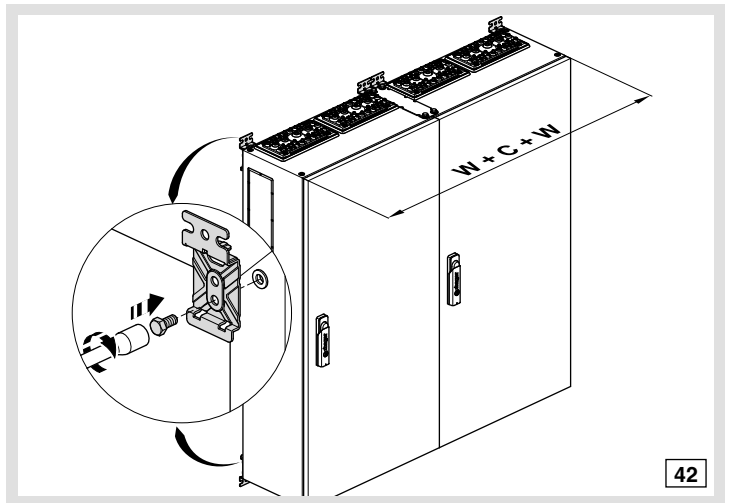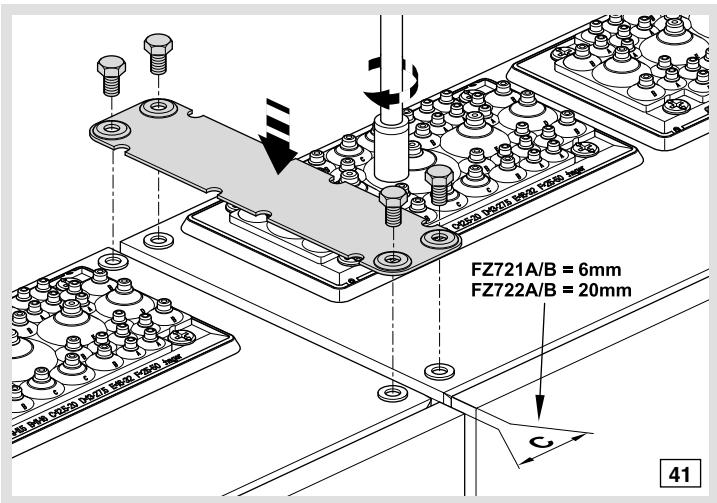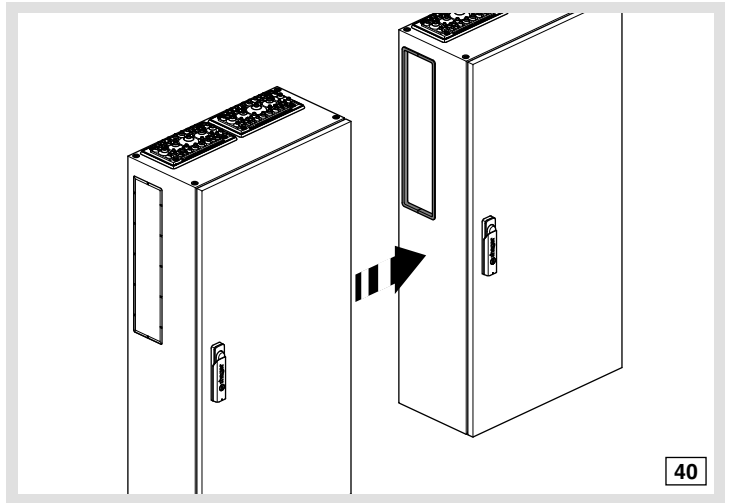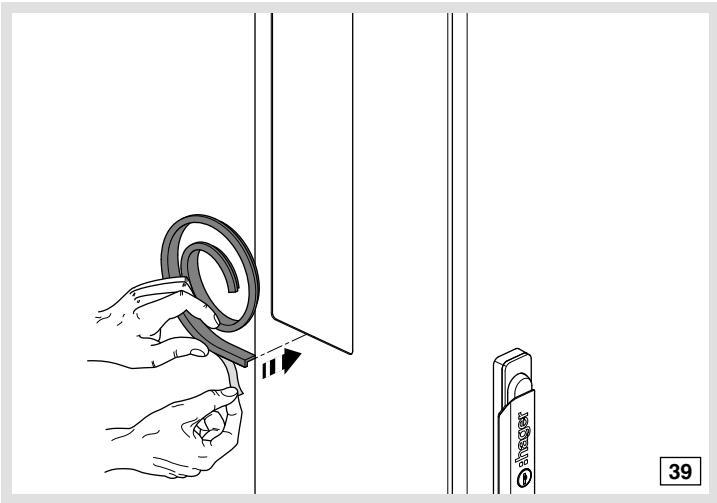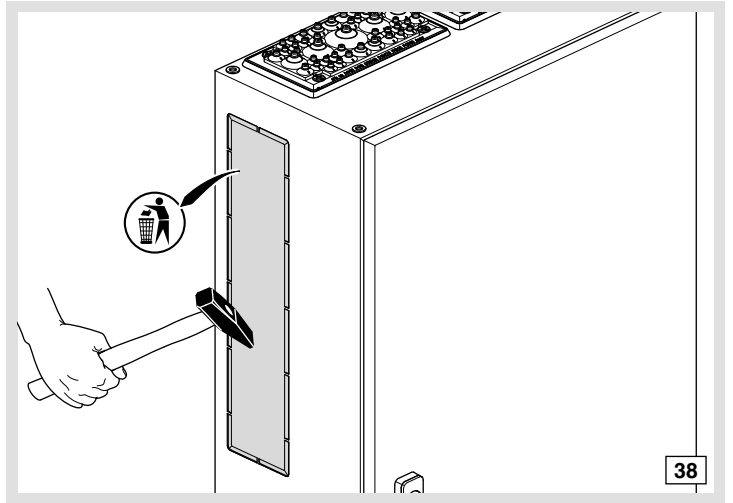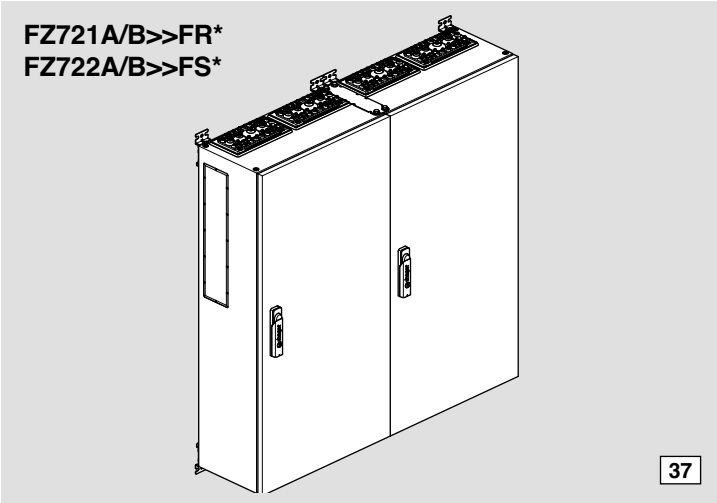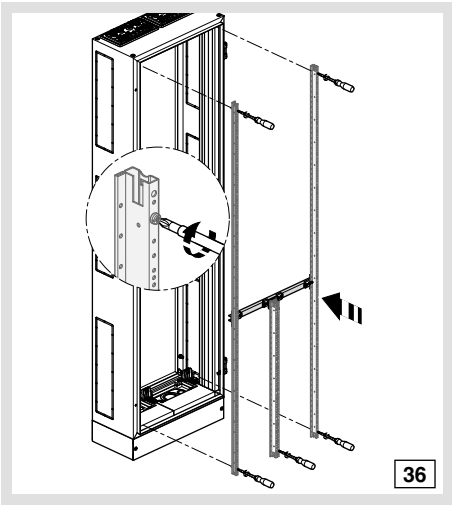


FZ77\*A

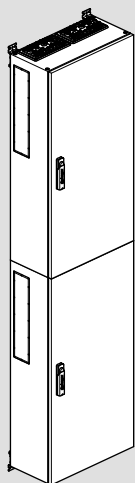


43

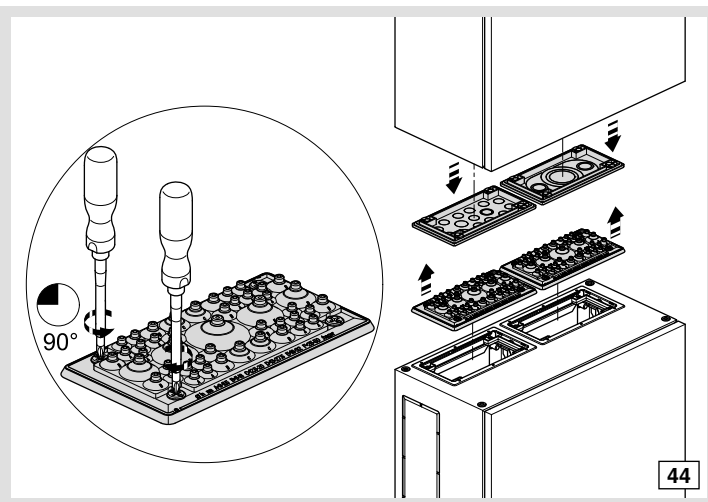


44

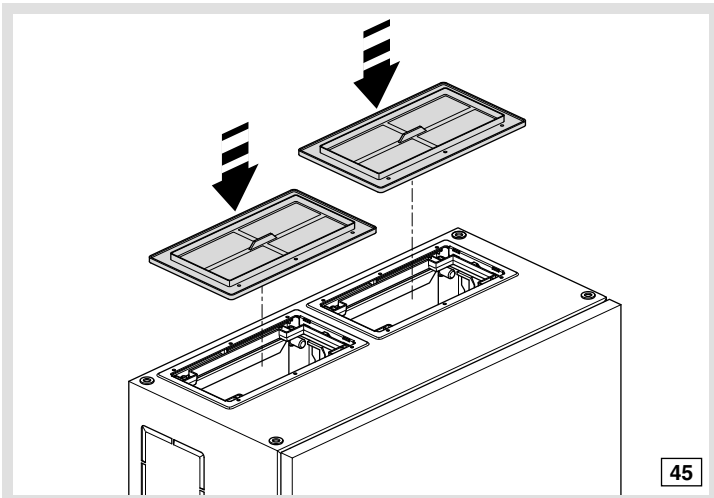

45

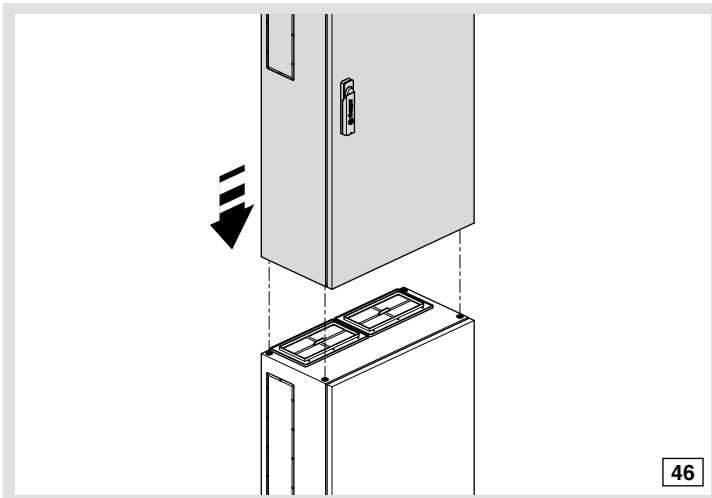


46

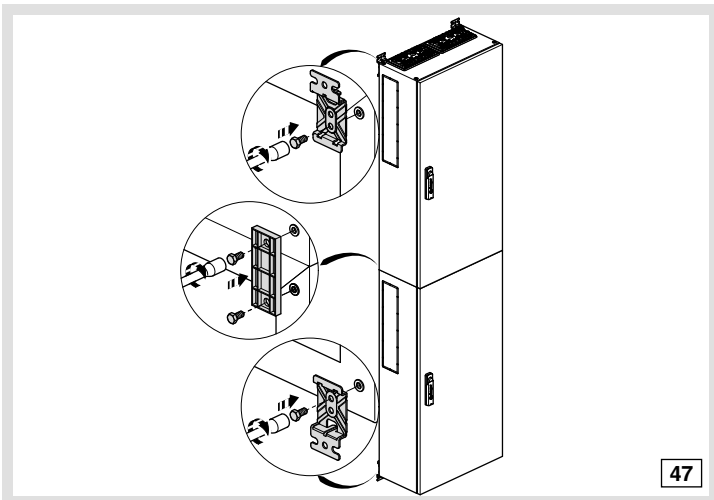


47


UT12L

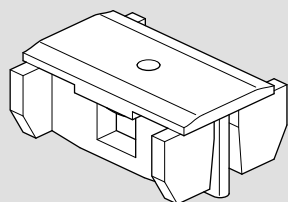

48

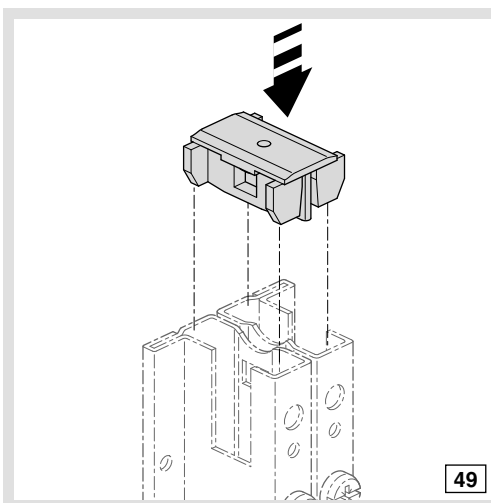


49


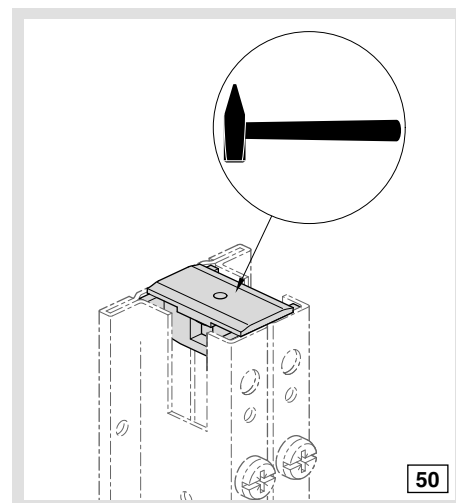


50


UT90G

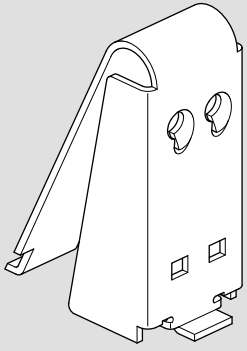



51

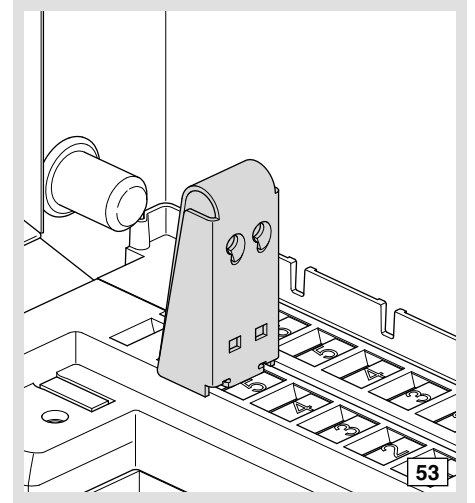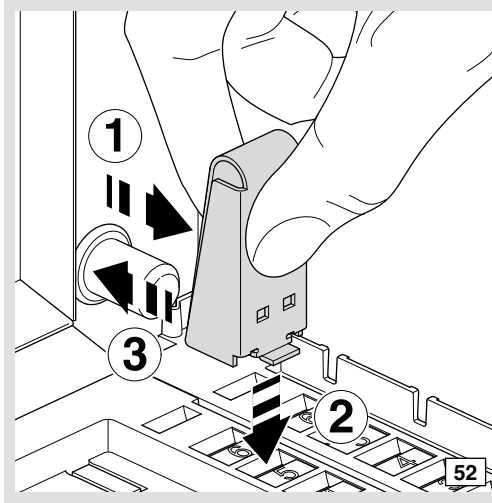


UT90J

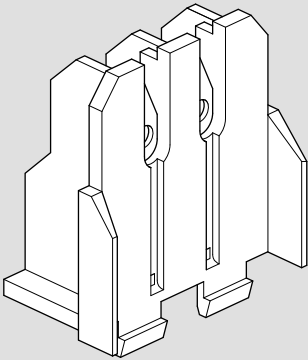

54

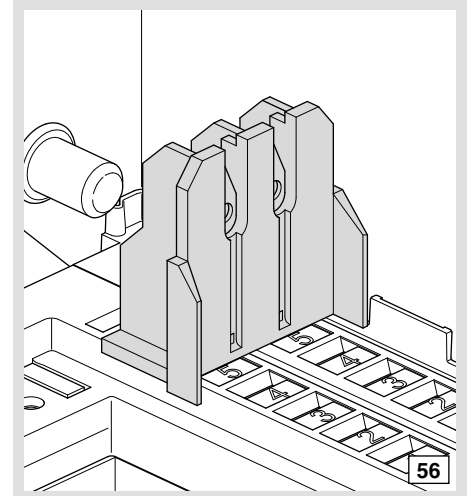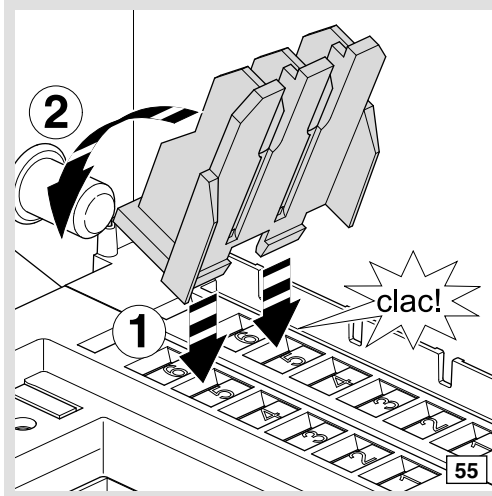

FZ537

 

57

