
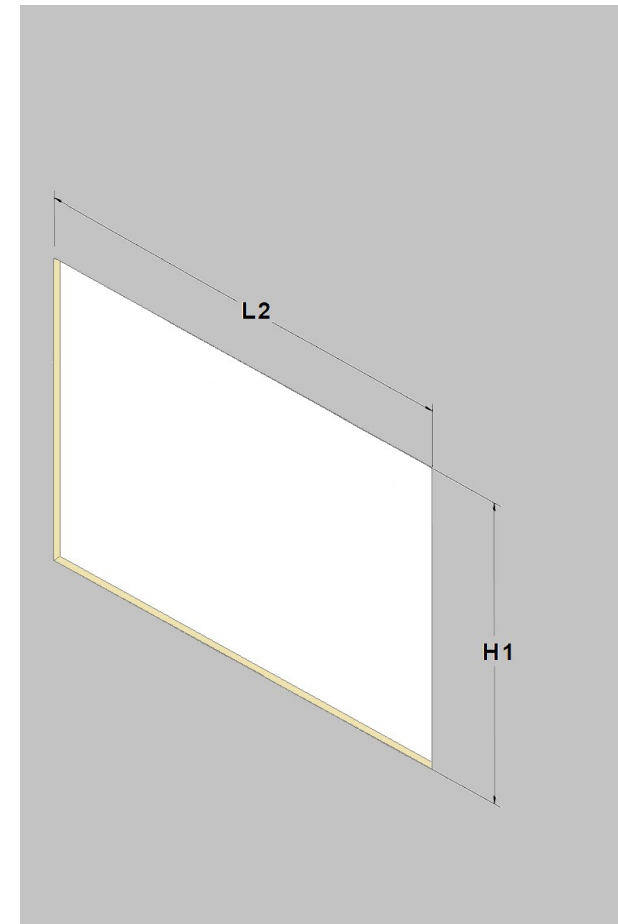
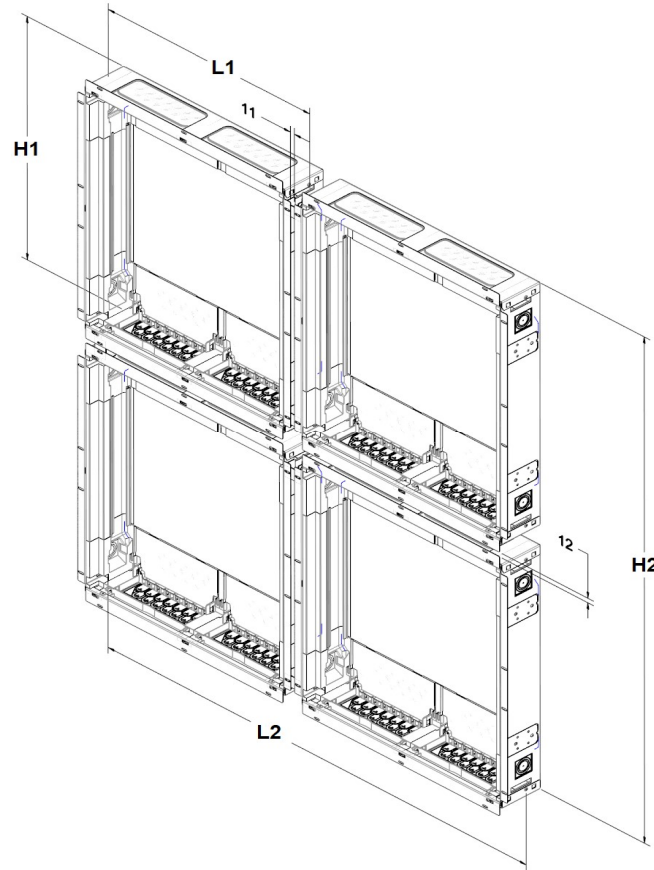


FWUwx.. + FWUyz.. + FWU00F1

FWU height first enclosure (w)	H1 (mm)	FWU height second enclosure (y)	H2 (mm)	FWU height second enclosure (y)	H2 (mm)	FWU height second enclosure (y)	H2 (mm)	FWU height second enclosure (y)	H2 (mm)	FWU height second enclosure (y)	H2 (mm)	FWU height second enclosure (y)	H2 (mm)
3	502	3	1057	4	1207	5	1357	6	1507	7	1657	8	1807
4	652	3	1207	4	1357	5	1507	6	1657	7	1807		
5	802	3	1357	4	1507	5	1657	6	1807				
6	952	3	1507	4	1657	5	1807						
7	1102	3	1657	4	1807								
8	1252	3	1807										

FWU width first enclosure (x)	L1 (mm)	FWU width second enclosure (z)	L2 (mm)	FWU width second enclosure (z)	L2 (mm)	FWU width second enclosure (z)	L2 (mm)
1	310	1	662	2	912	3	1162
2	560	1	912	2	1162	3	1412
3	810	1	1162	2	1412	3	1662

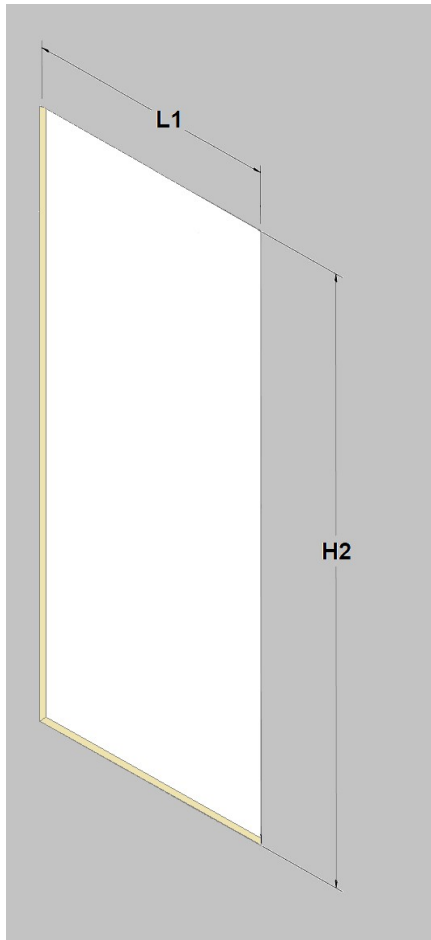

6LE007280B hager 11.2021