







ZAX004 / ZAX005 ZAX006 / ZAX007

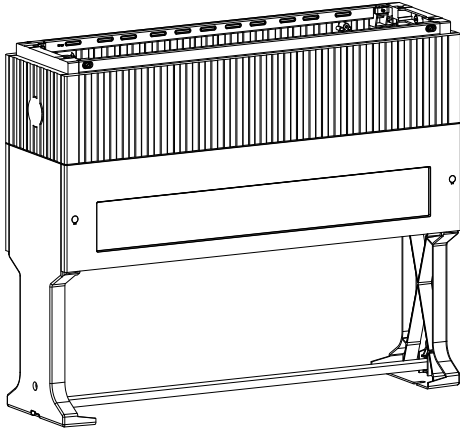



- | | | | |
|------|--------------------------|------|-------------------------|
| Ⓧ DE | Montageanleitung | Ⓧ HR | Upute za montažu |
| Ⓧ FR | Notice d'instructions | Ⓧ HU | Szerelési útmutató |
| Ⓧ GB | Mounting instructions | Ⓧ LT | Montavimo instrukcija |
| Ⓧ NL | Montage instructie | Ⓧ LV | Montāžas instrukcija |
| Ⓧ DK | Monteringsvejledning | Ⓧ PL | Instrukcja montażowa |
| Ⓧ FI | Asennusohje | Ⓧ RO | Instructiuni de montare |
| Ⓧ NO | Montasjeanvisning | Ⓧ SK | Návod na montáž |
| Ⓧ SE | Monteringsinstruktioner | Ⓧ RU | Указания по установке |
| Ⓧ IT | Istruzioni di montaggio | Ⓧ BG | Инструкции за монтаж |
| Ⓧ ES | Instrucciones de montaje | Ⓧ GR | Οδηγίες συναρμολόγησης |
| Ⓧ PT | Instruções de montagem | Ⓧ SI | Navodilo za montažo |
| Ⓧ CZ | Montážní návod | Ⓧ EE | Paigaldusjuhised |
| Ⓧ BA | Uputstvo za montažu | Ⓧ IS | Leiðbeiningar |
| Ⓧ UK | Інструкції з установки | Ⓧ AR | بيكترتال تامي لعت |

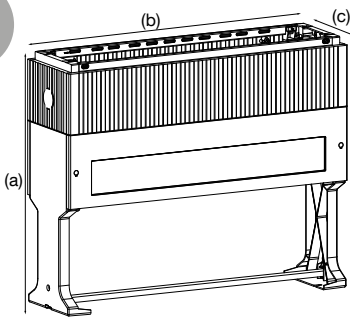

	a (mm)	b (mm)	c (mm)
ZAX004	900	480	315
ZAX005	900	585	315
ZAX006	900	780	315
ZAX007	900	1110	315

  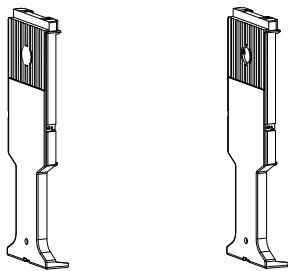 

ZAX004 = x 1
ZAX005 = x 1
ZAX006 = x 2
ZAX007 = x 3

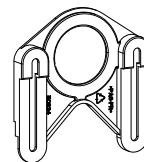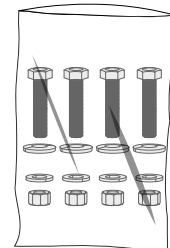

x 4

x 4

x 4

x 4

x 4


x 1

x 2


x 2

x 2


1

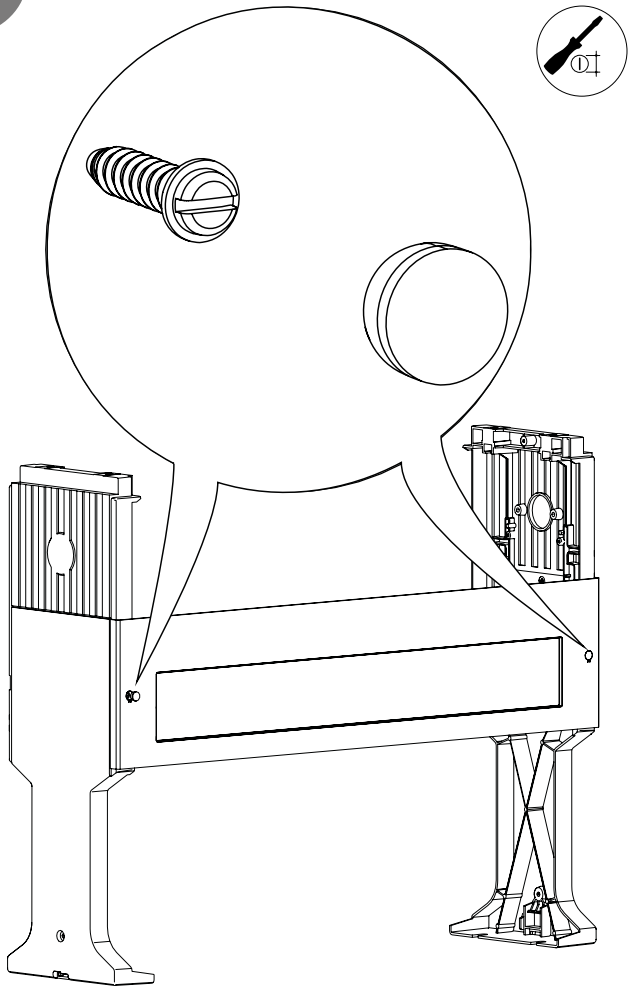


2

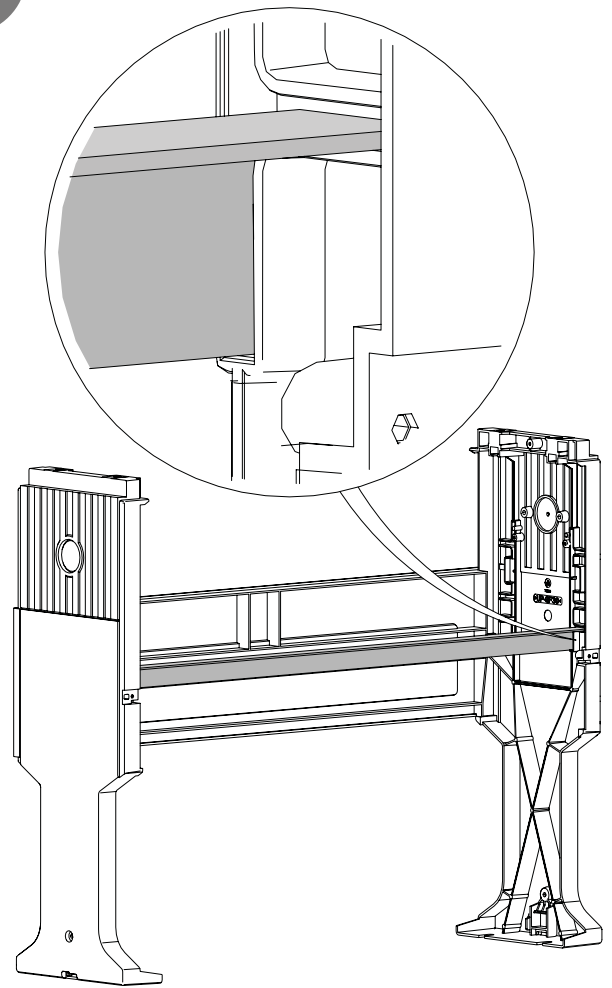


3

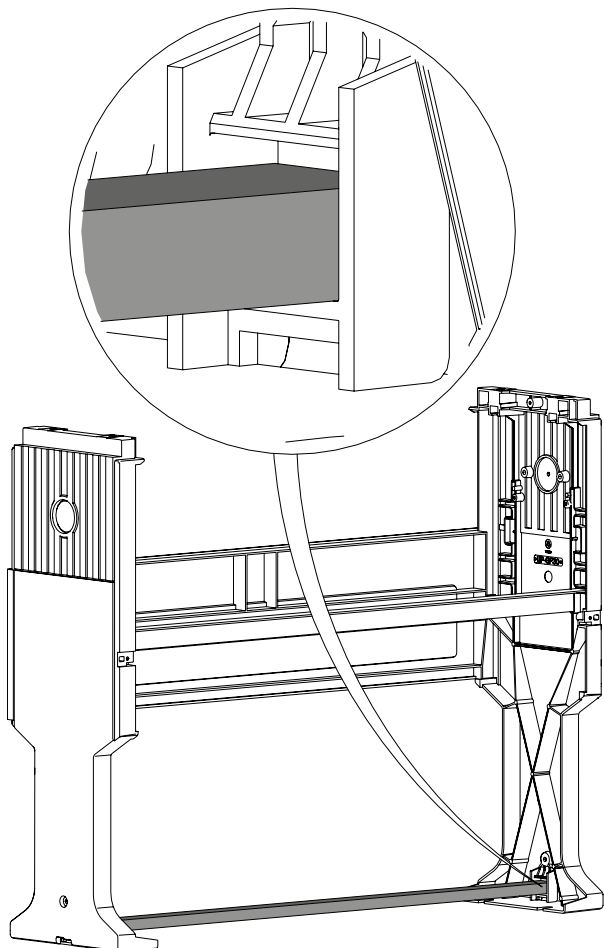


4

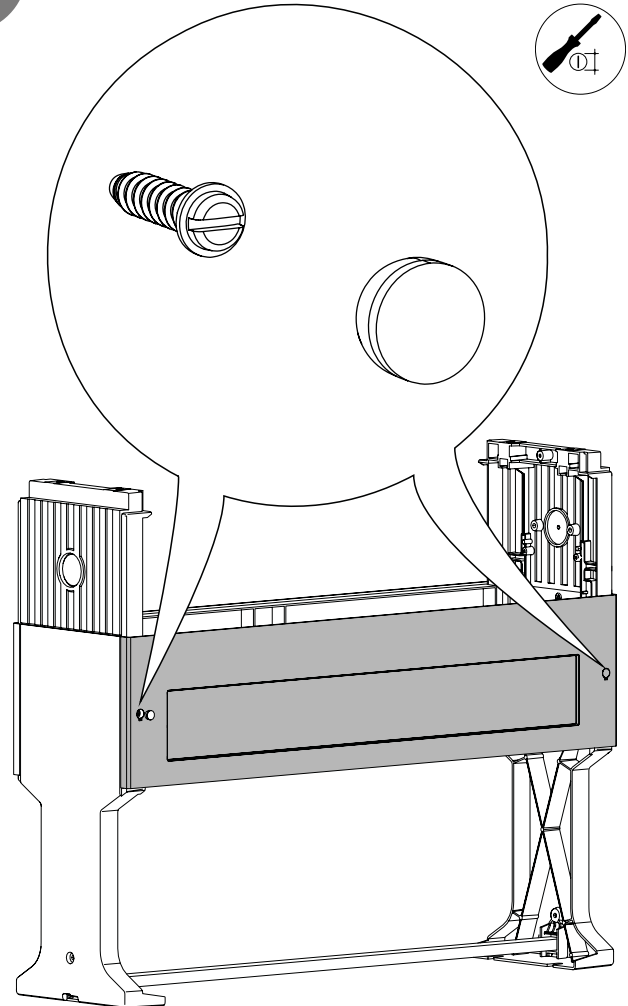


5

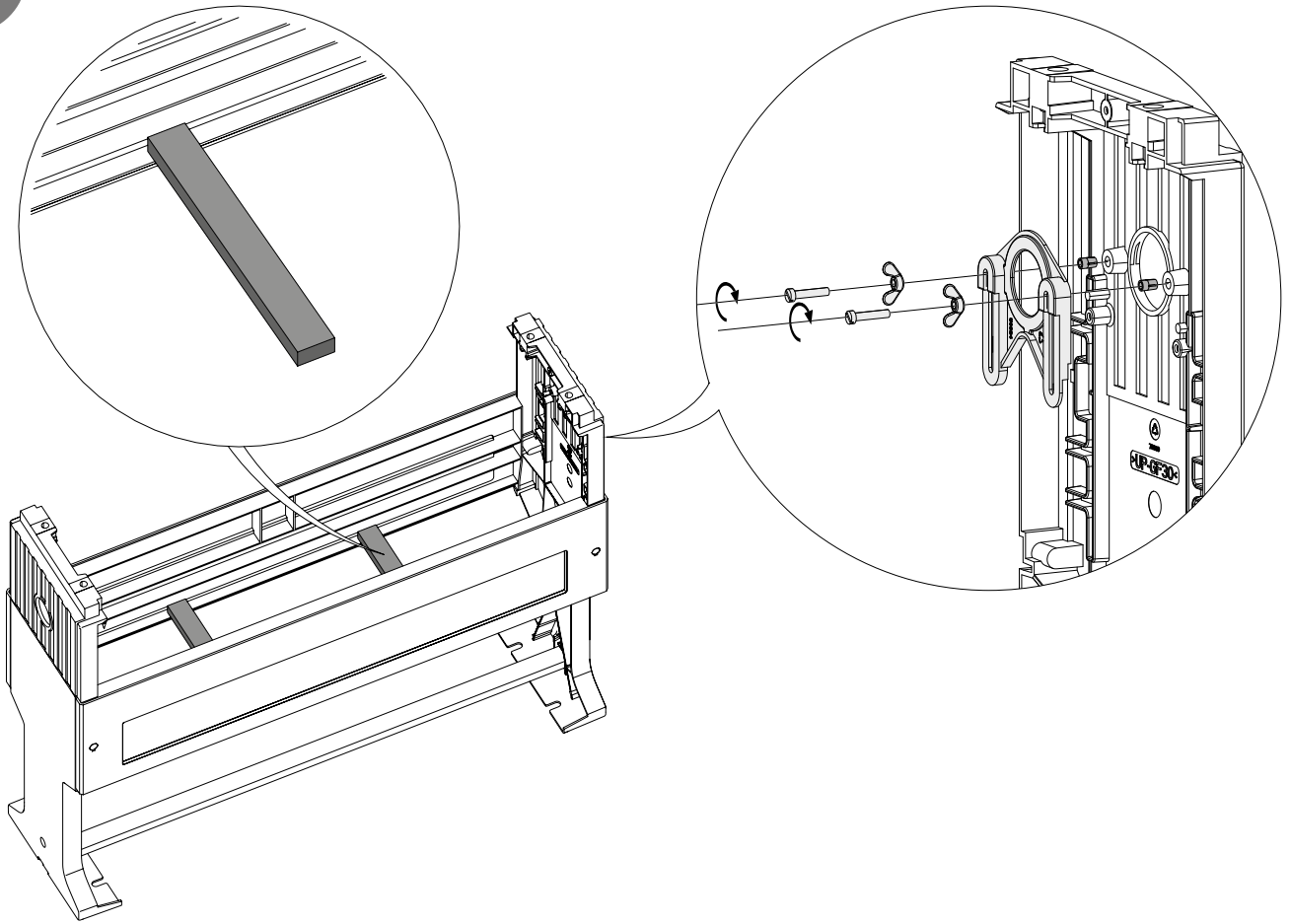


6

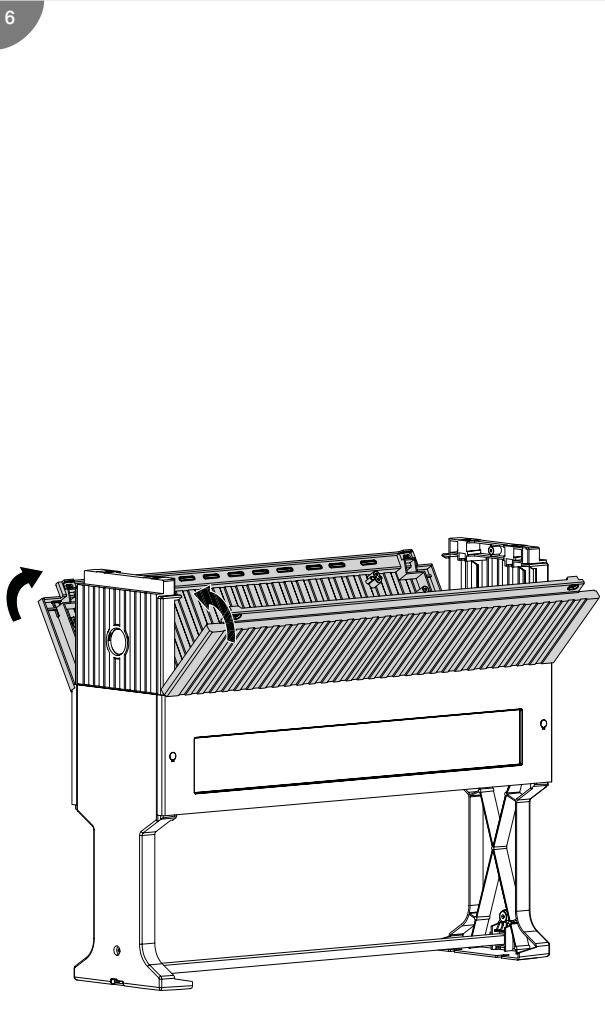


7

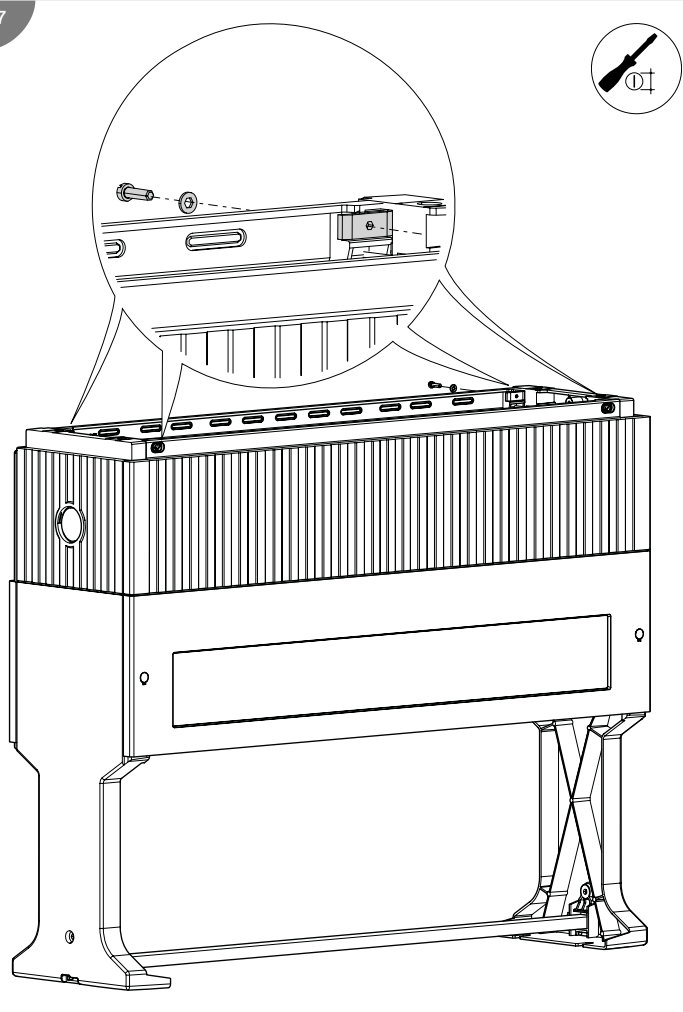


8

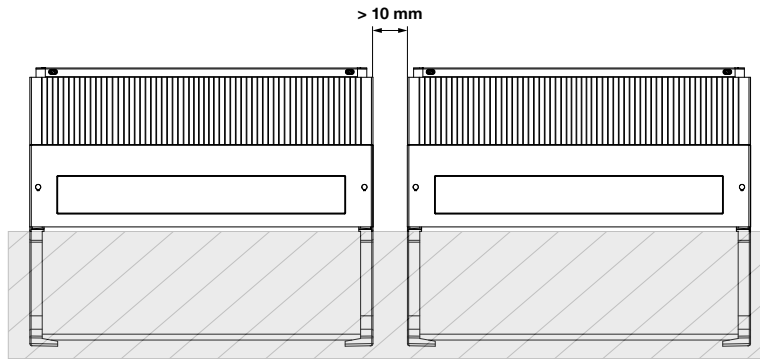

9

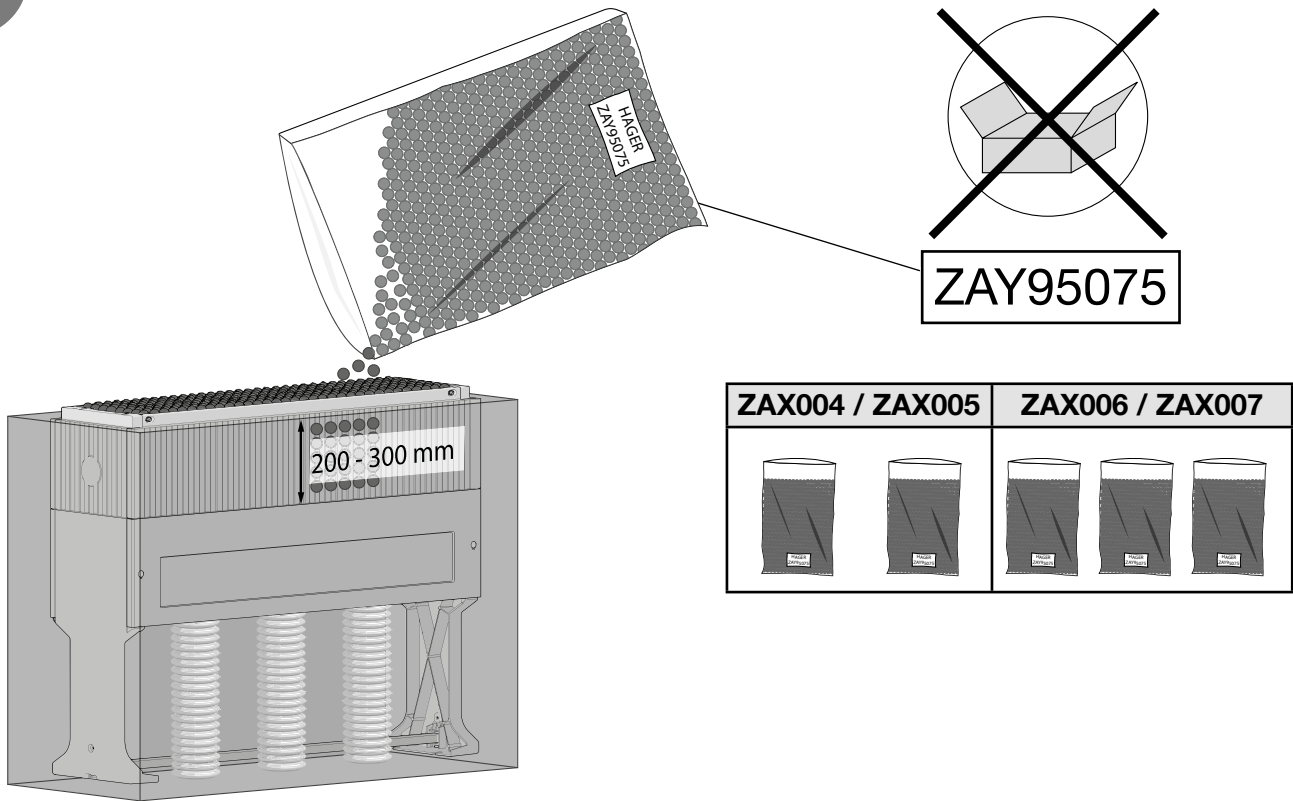

10

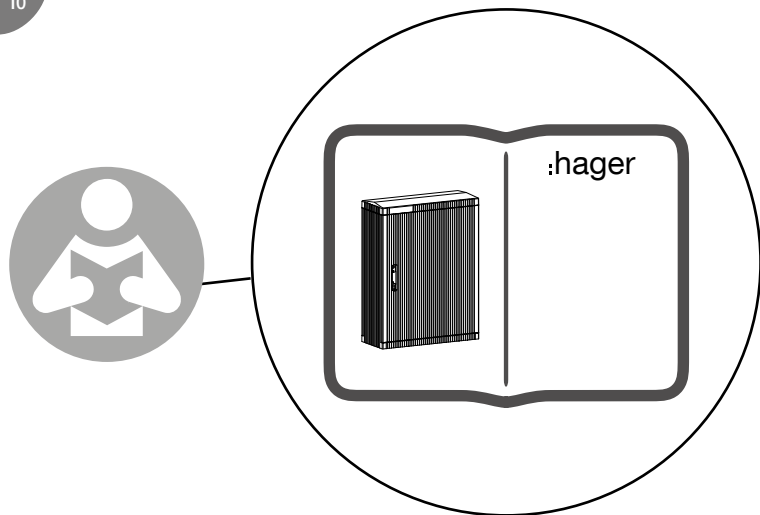

11

