








473-262-002a

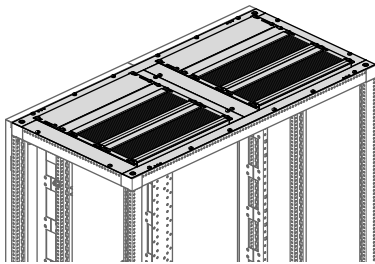




**Moduldach**

- ⒹⒺ Montageanleitung
- ⒻⒻ Notice d'instructions
- ⒼⒸ Mounting instructions
- ⒶⒻ Montage instructie
- ⒹⒶ Monteringsvejledning
- ⒻⒾ Asennusohje
- ⒶⒽⒹ Montasjeanvisning
- ⒶⒺ Monterings instruktioner
- ⒶⒼ Istruzioni di montaggio
- ⒶⒶ Instrucciones de montaje
- ⒶⒽ Instruções de montagem
- ⒸⒶ Montážní návod
- ⒶⒶ Uputstvo za montažu
- ⒶⒶ Інструкції з установки




- ⒻⒻ Upute za montažu
- ⒻⒶ Szerelési útmutató
- ⒻⒽ Montavimo instrukcija
- Ⓕ⒱ Montāžas instrukcija
- ⒻⒶ Instrukcja montażowa
- ⒶⒼ Instructiuni de montare
- ⒶⒶ Návod na montáž
- ⒶⒶ Указания по установке
- ⒶⒶ Инструкции за монтаж
- ⒶⒶ Οδηγίες χώνευσης
- ⒶⒶ Navodilo za montažo
- ⒶⒶ Paigaldusjuhised
- ⒶⒶ Leiðbeiningar
- ⒶⒶ دليل التركيب

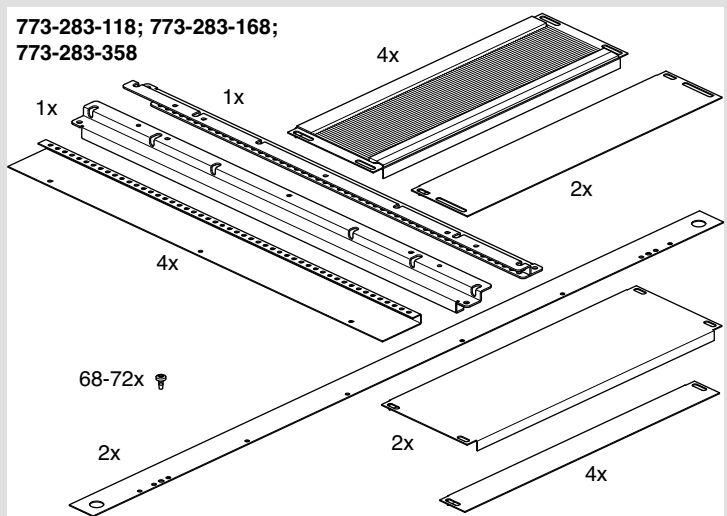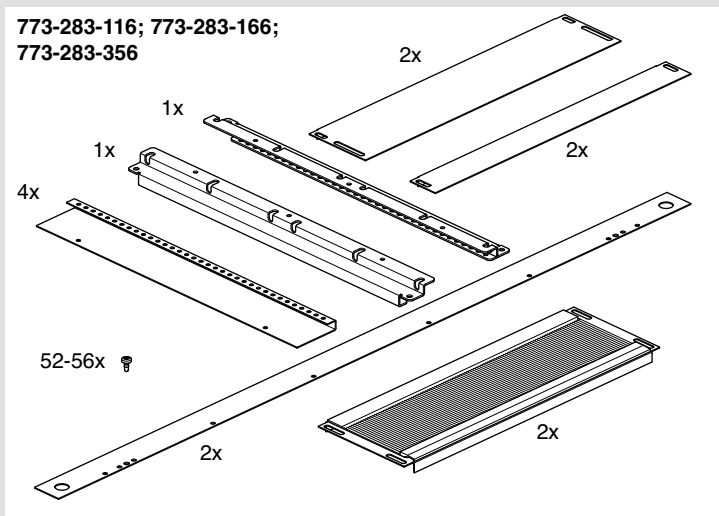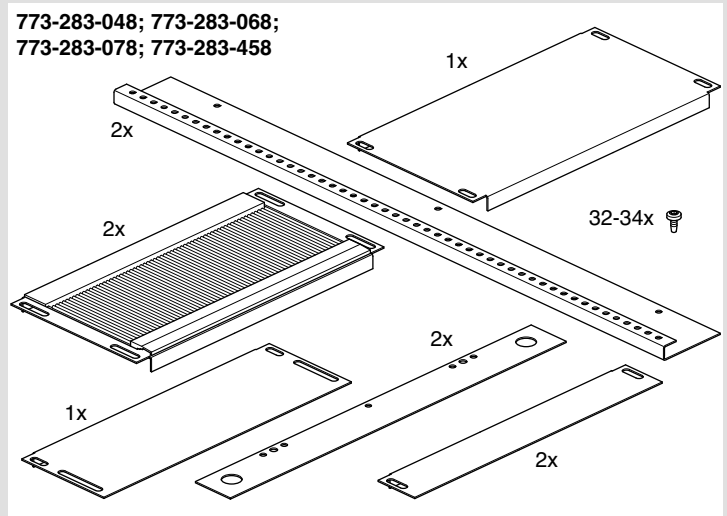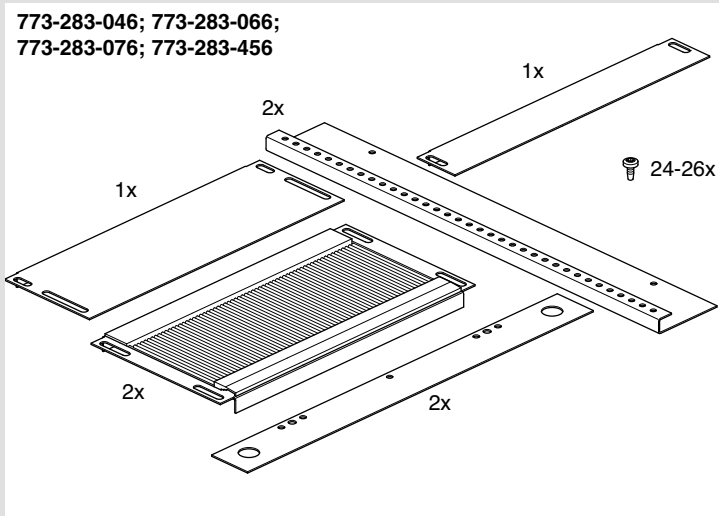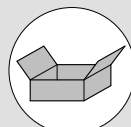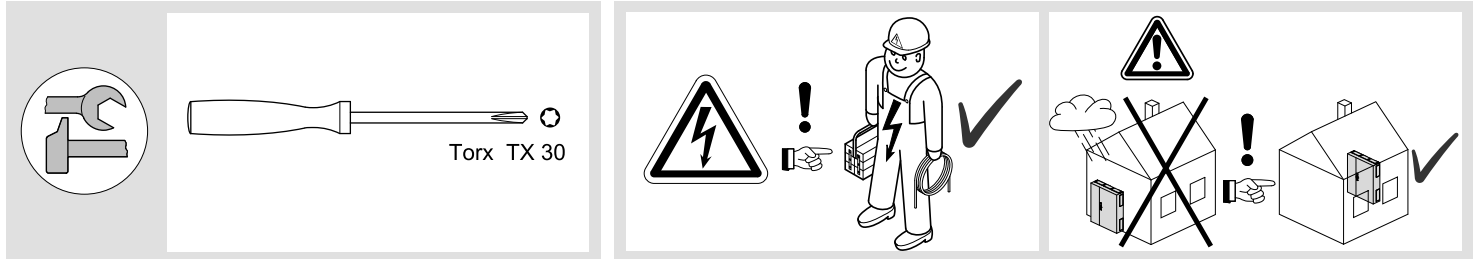





773-283-046; 773-283-066;  
773-283-076; 773-283-456

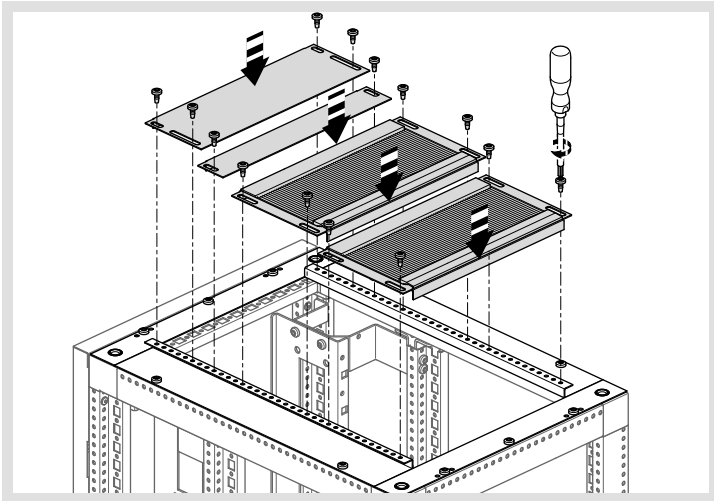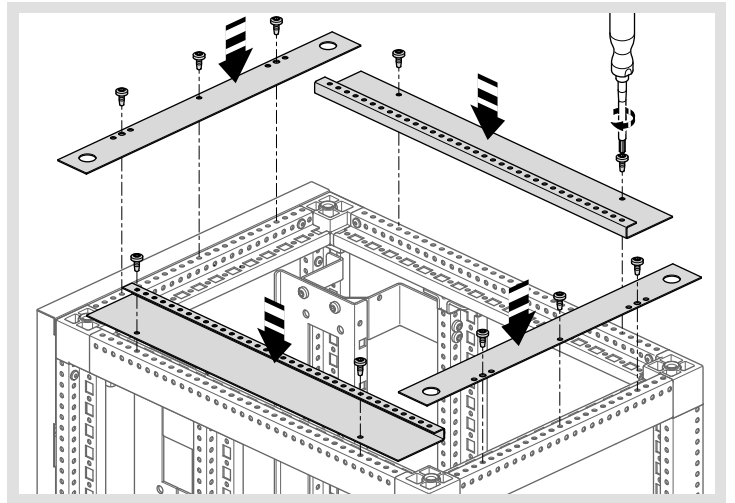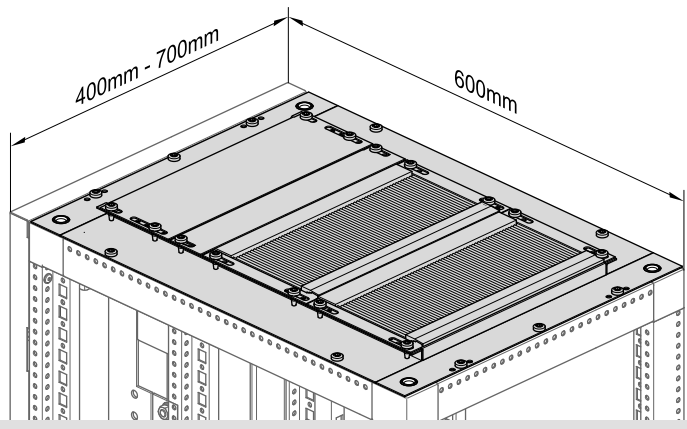





773-283-048; 773-283-068;  
773-283-078; 773-283-458

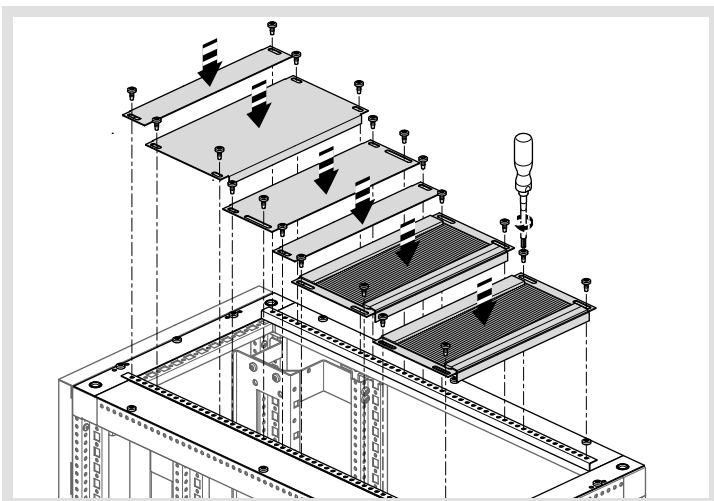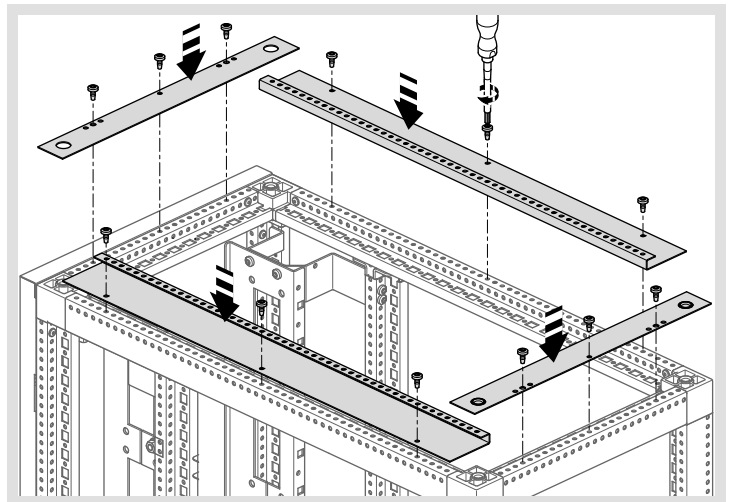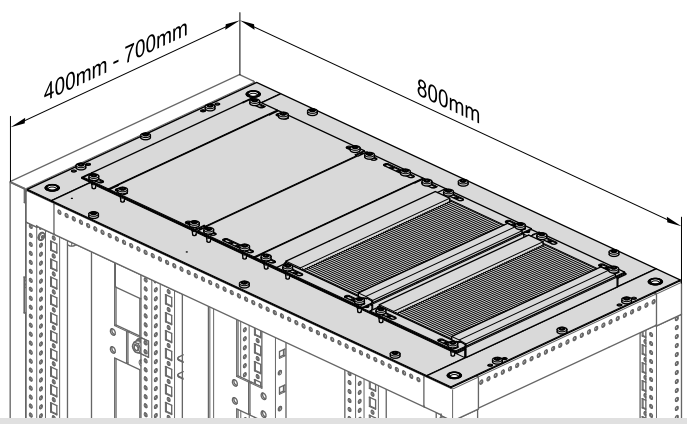

773-283-116; 773-283-166;  
773-283-356

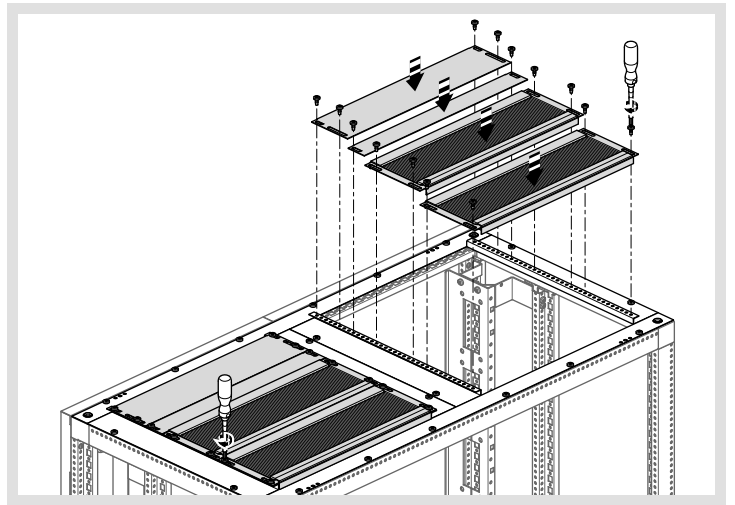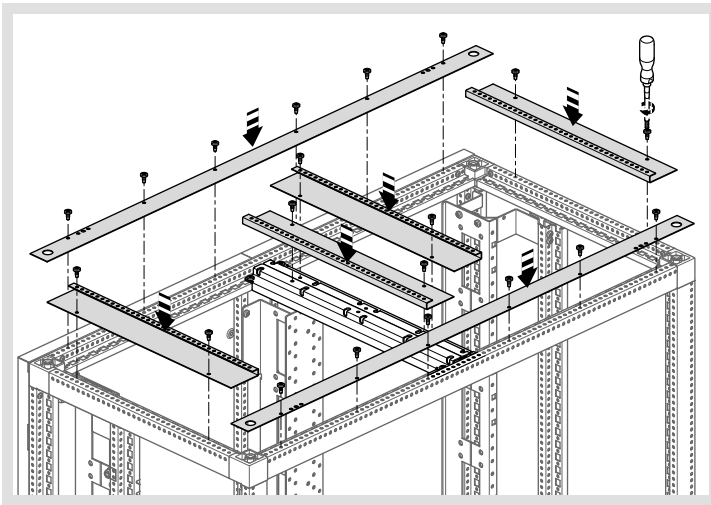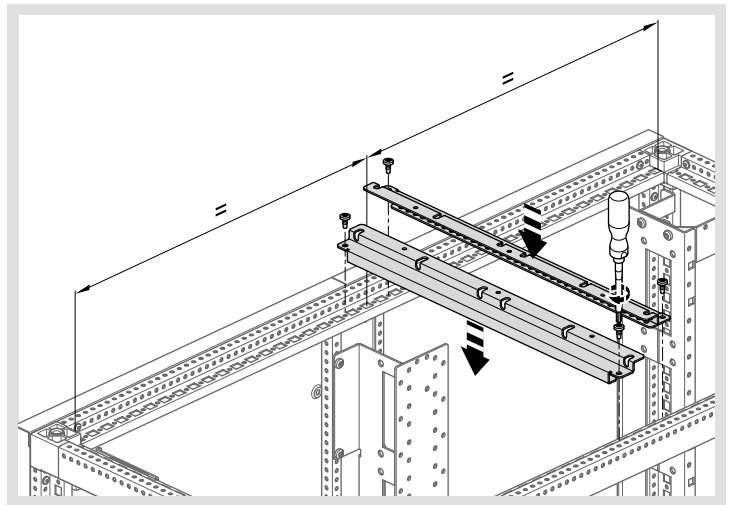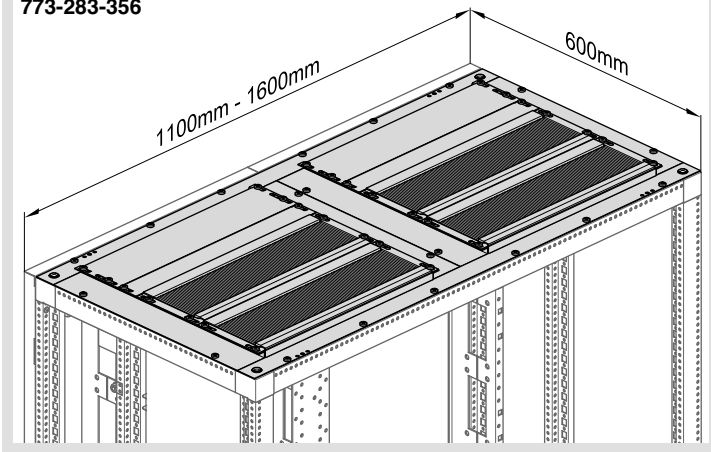

773-283-118; 773-283-168;  
773-283-358

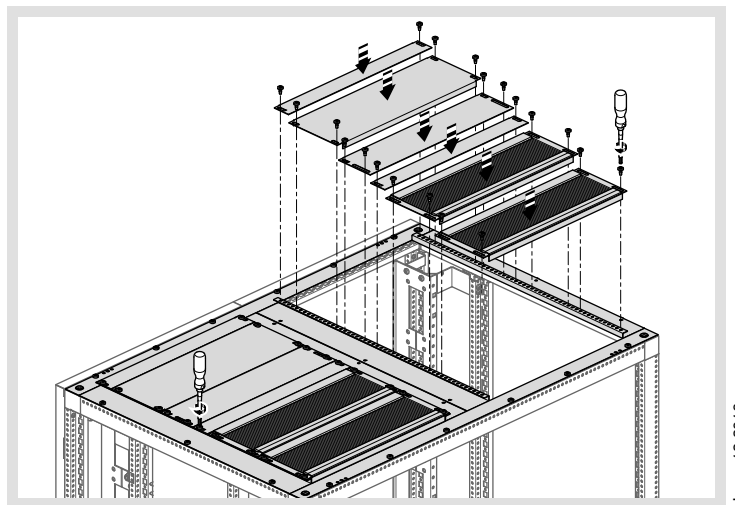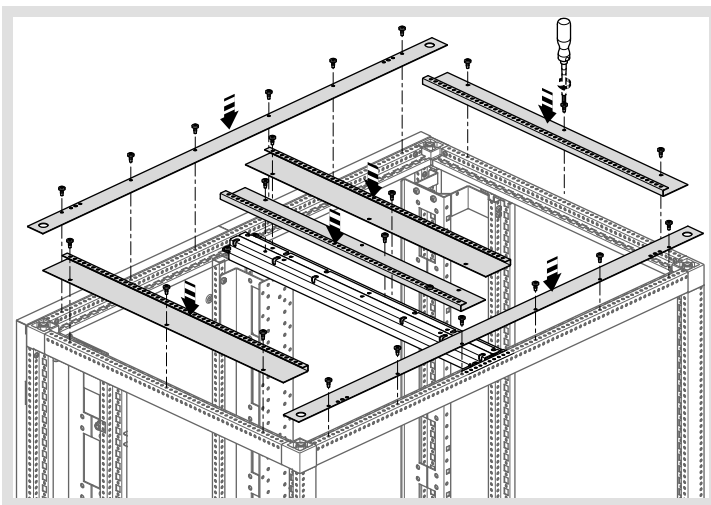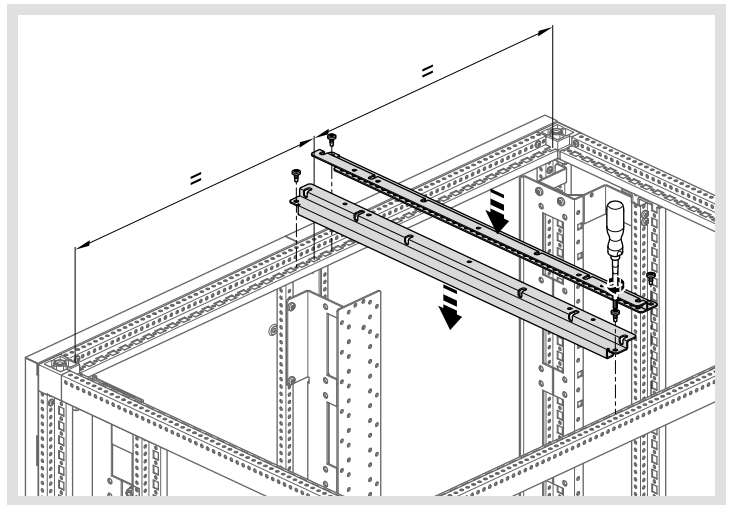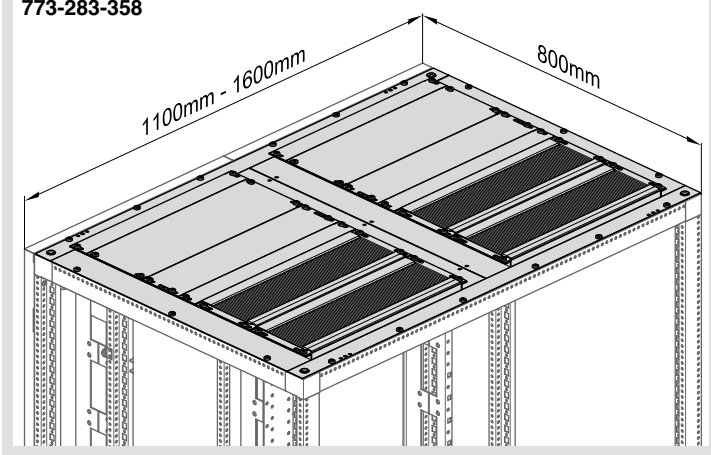

Hager 12.2016