


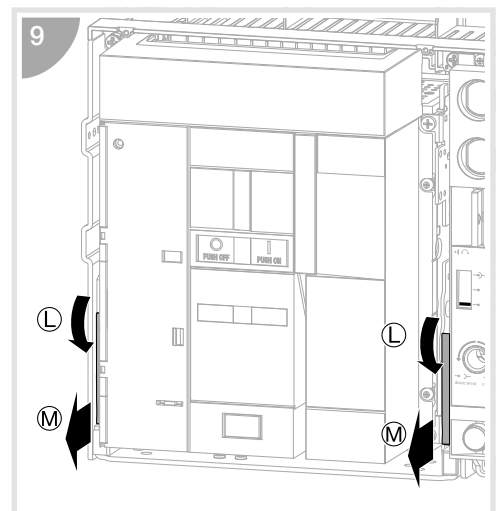
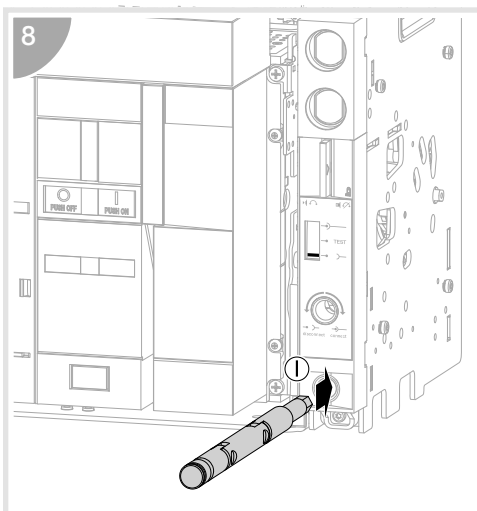
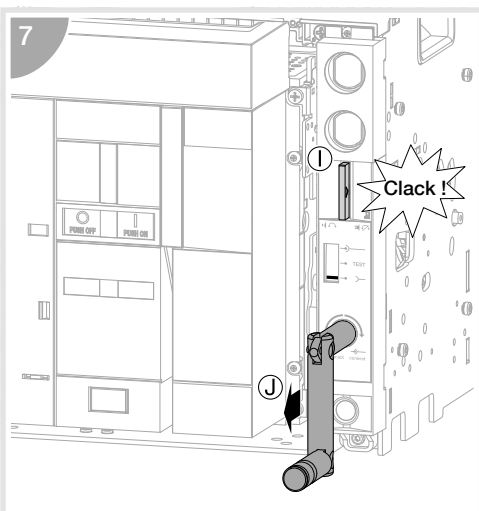
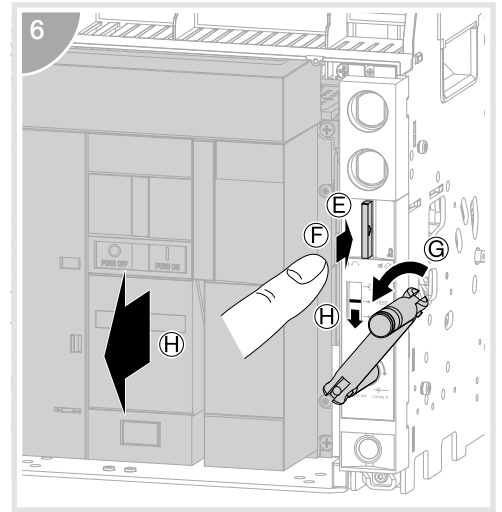
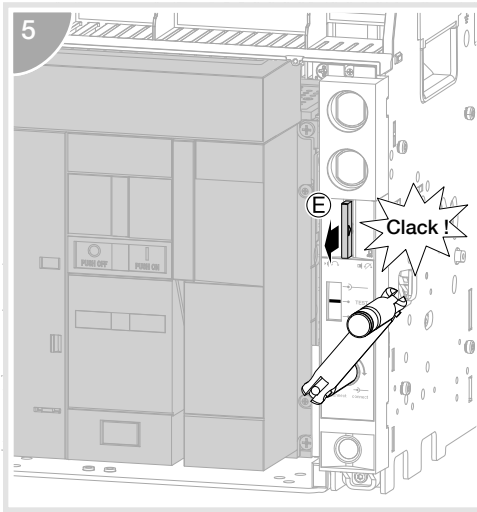
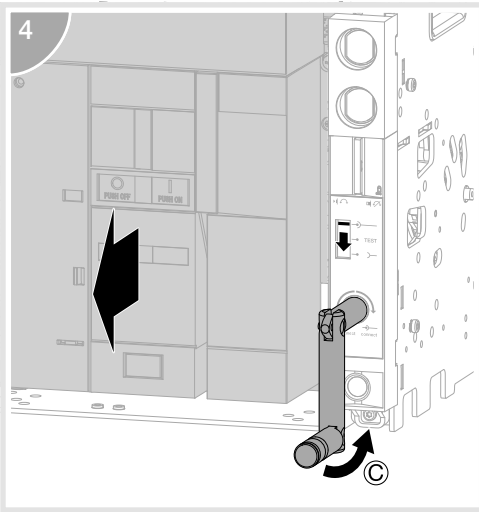
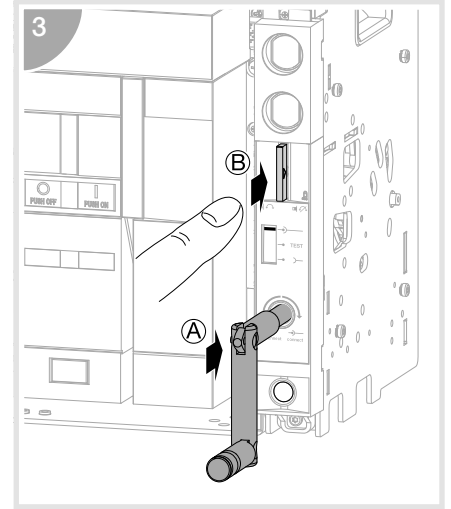
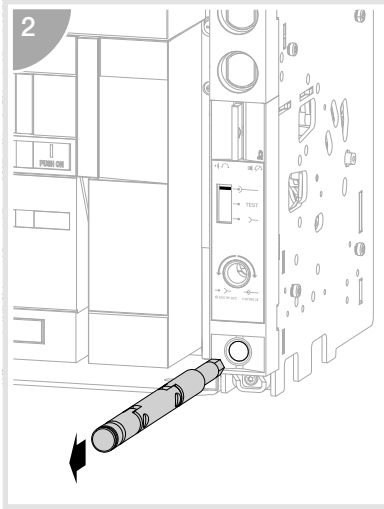
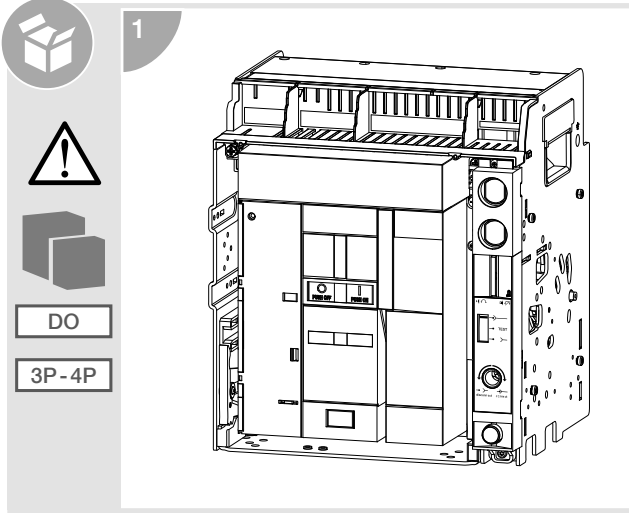
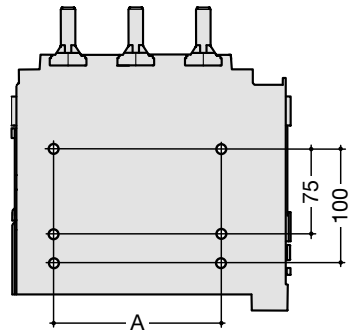
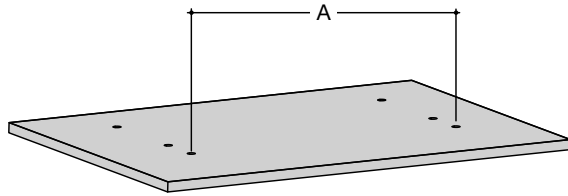
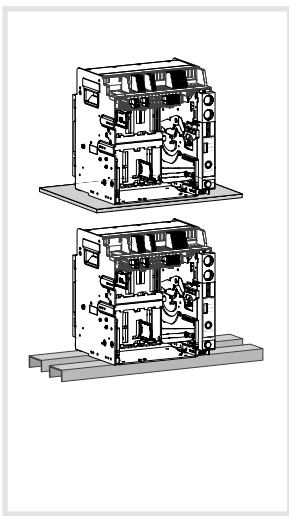
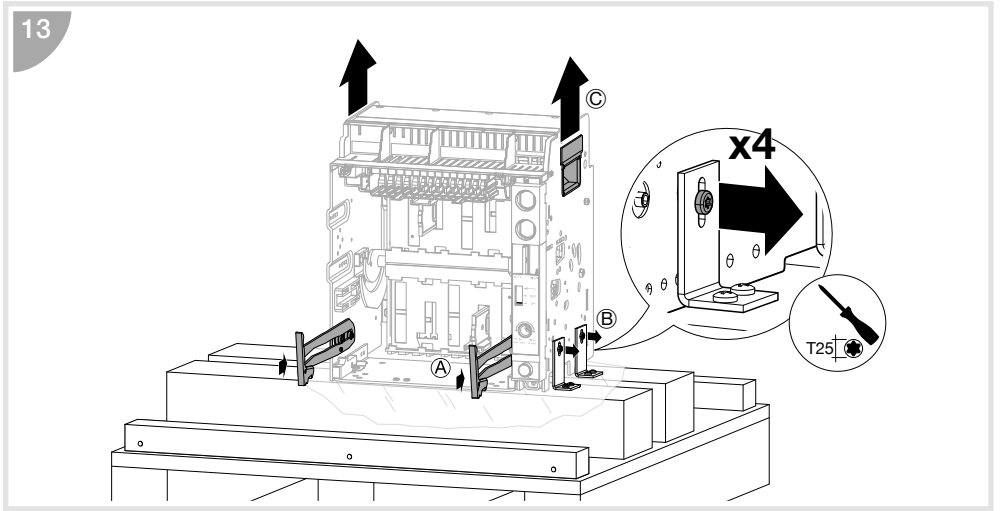
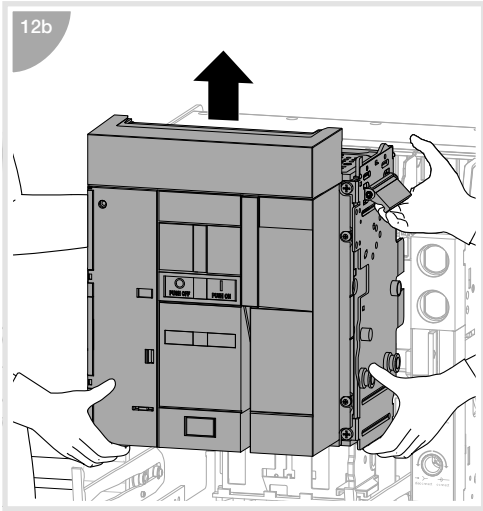
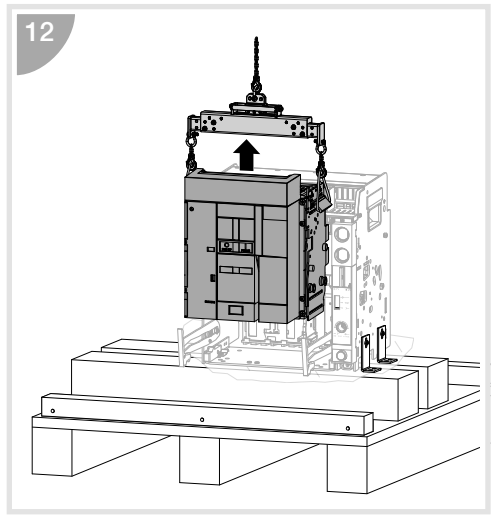
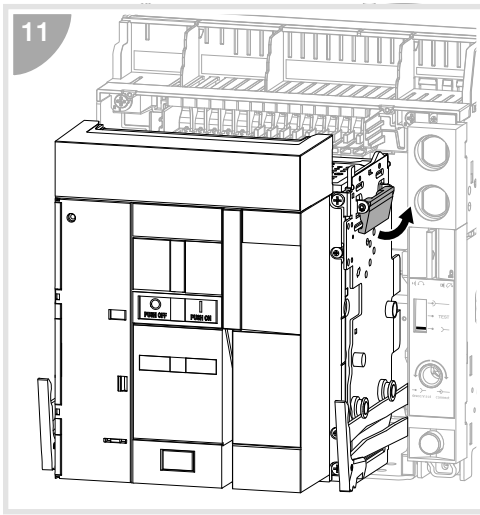
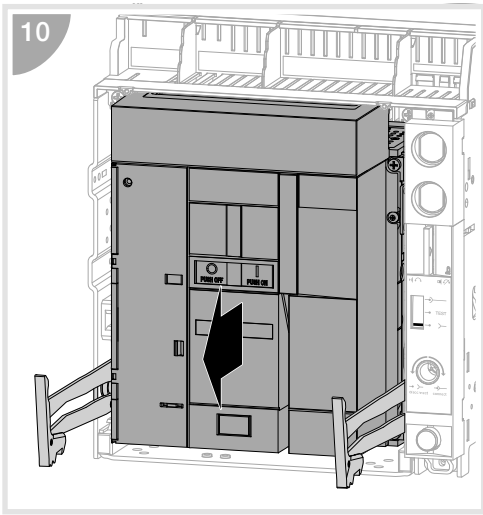





## HW1

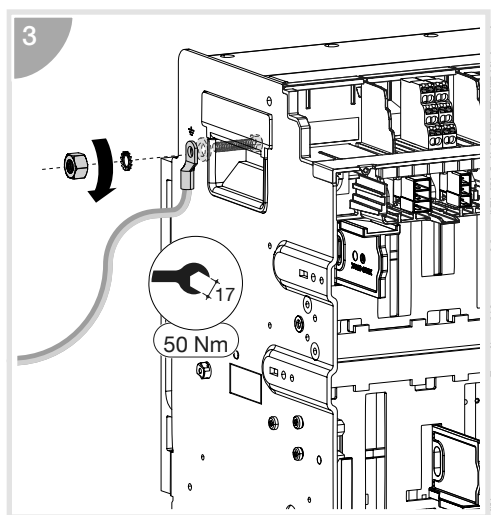







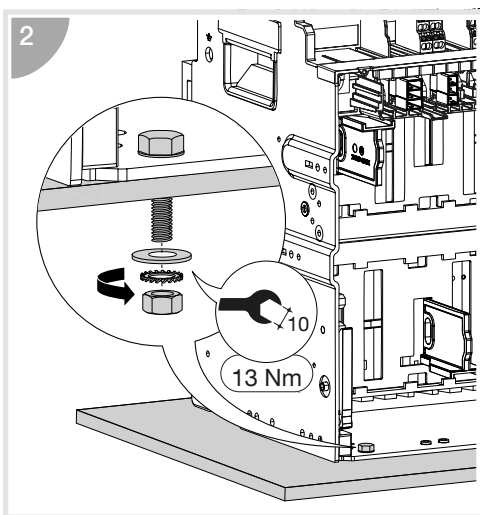



	3P	4P
A (mm)	180	250

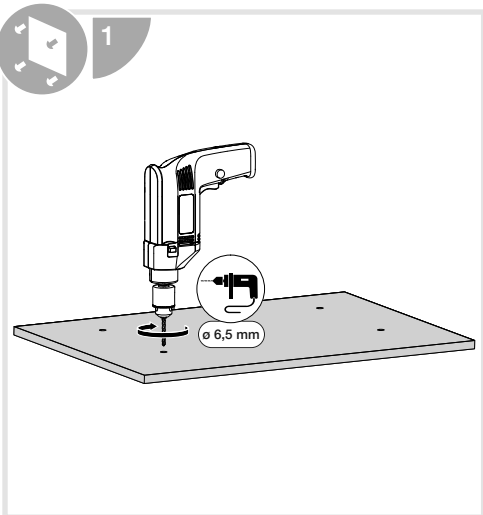

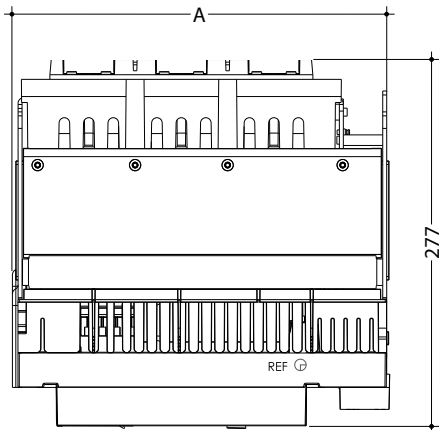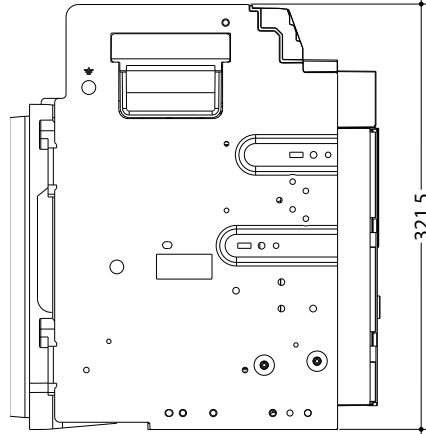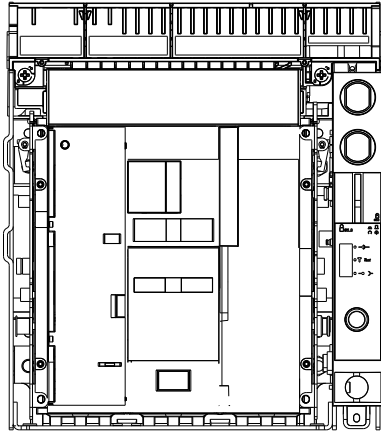

	3P	4P
A (mm)	283,1	348.8

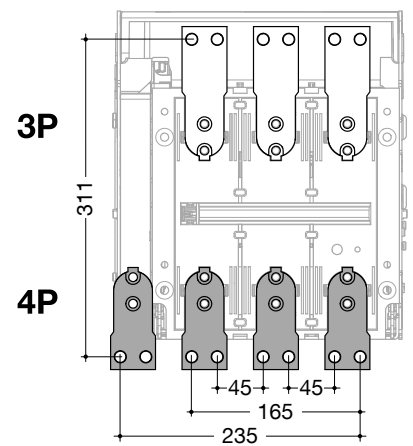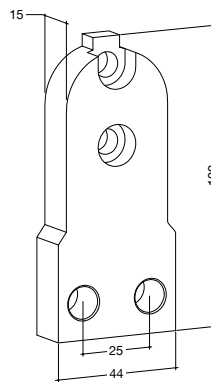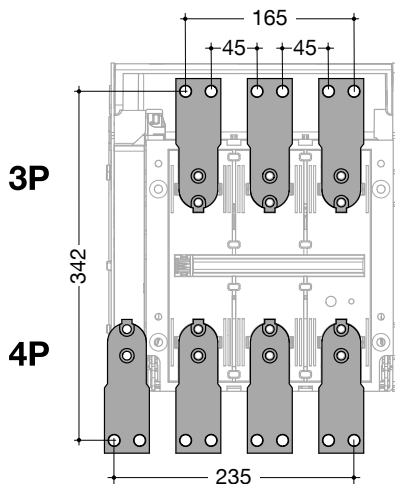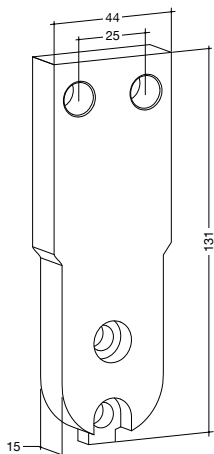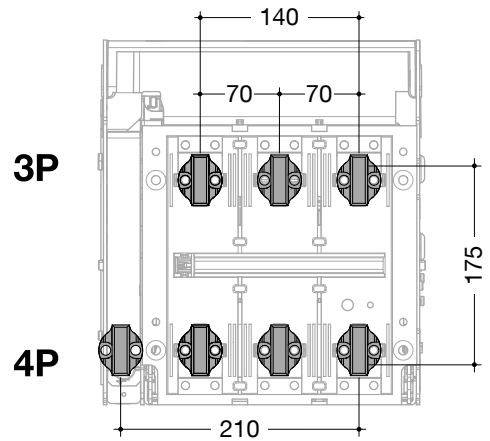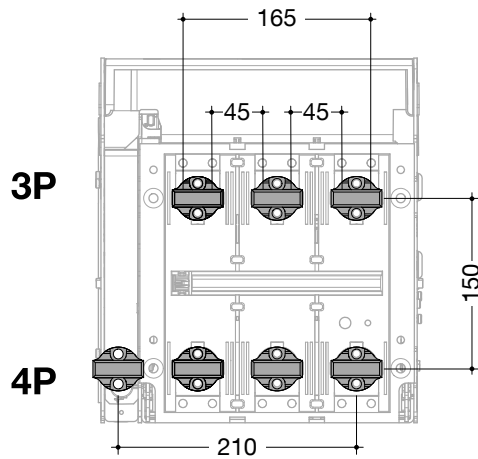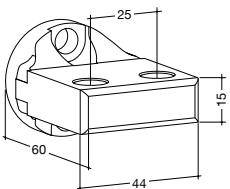

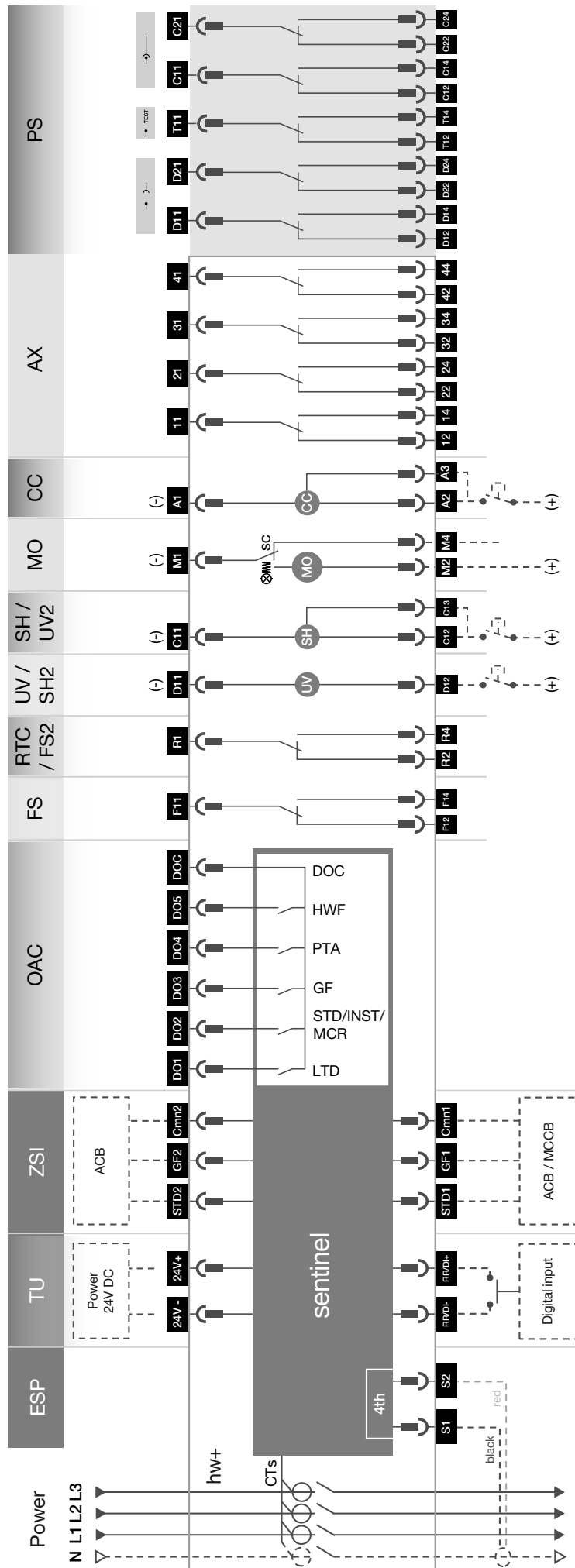




1





FIX


3P-4P

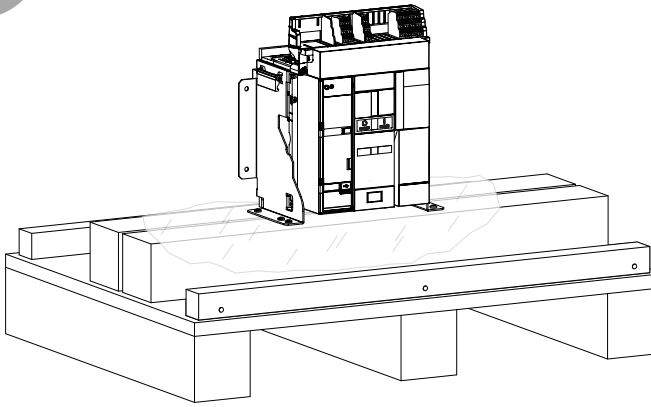





2

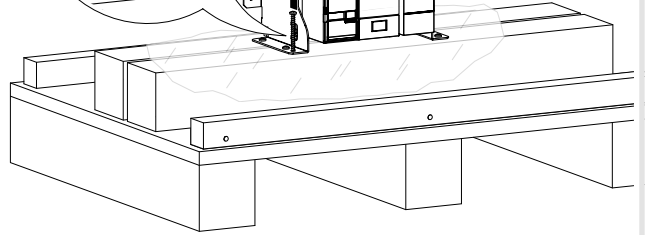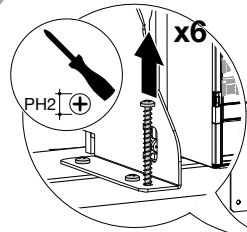

3

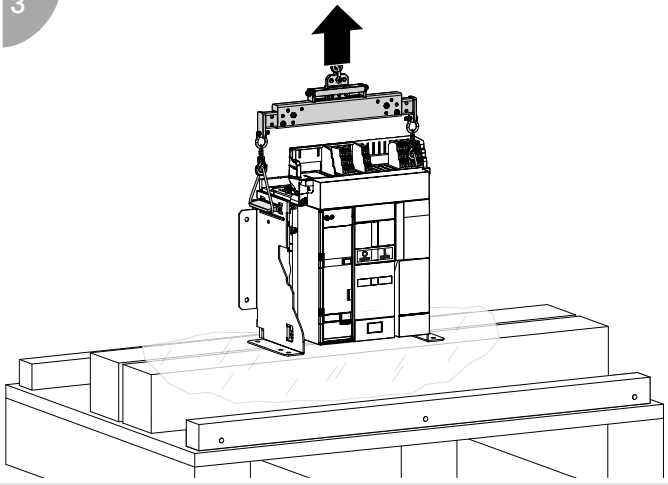


3b

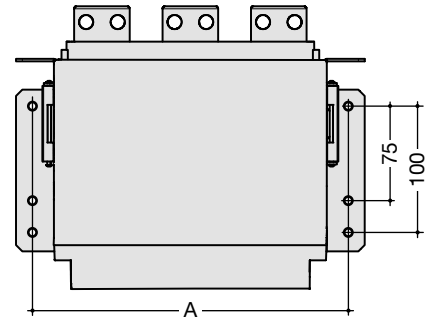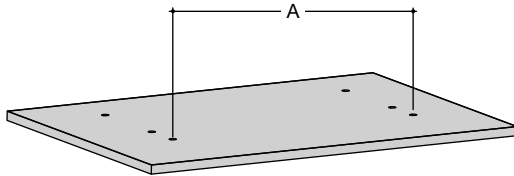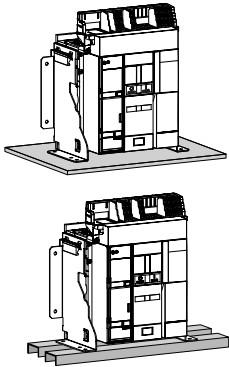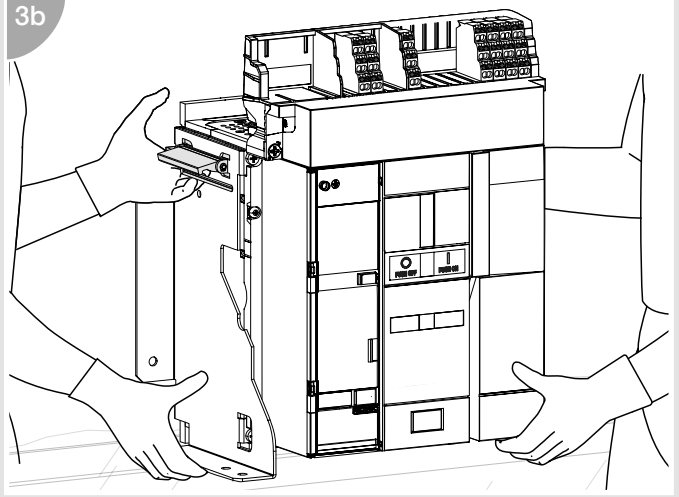


	3P	4P
A (mm)	250	320




1


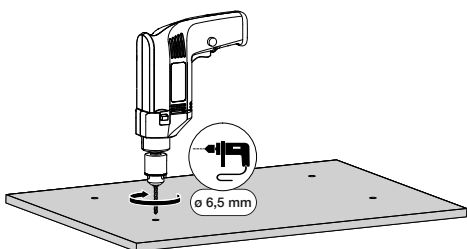


2






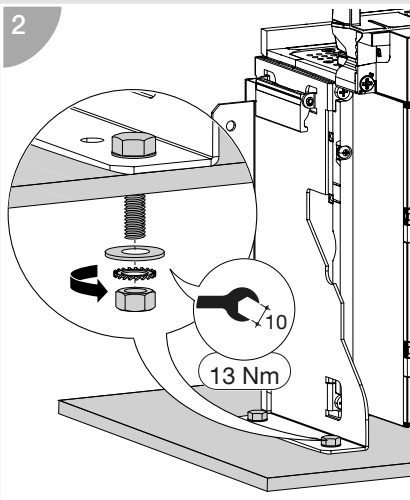


3

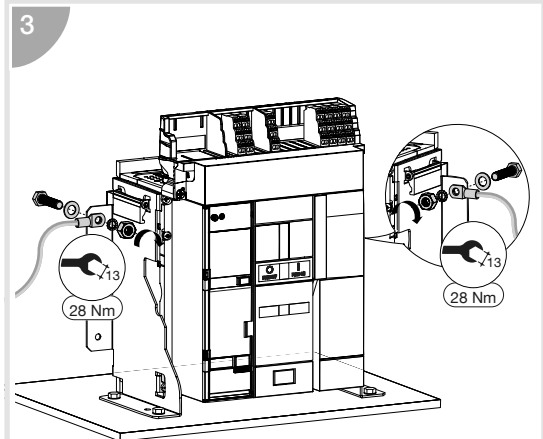

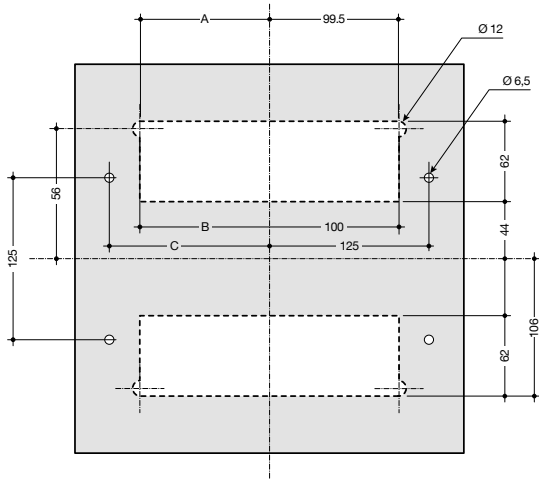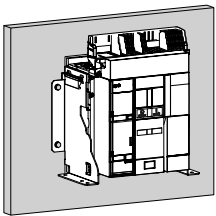

	3P	4P
A (mm)	99,5	169,5
B (mm)	100	170
C (mm)	125	195

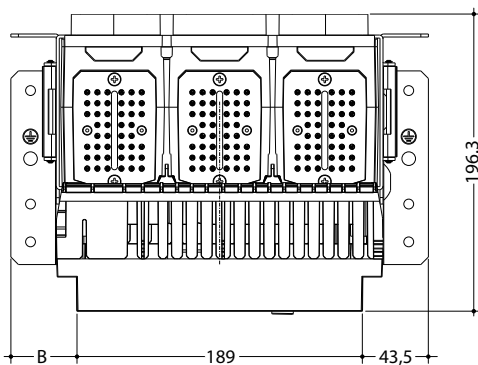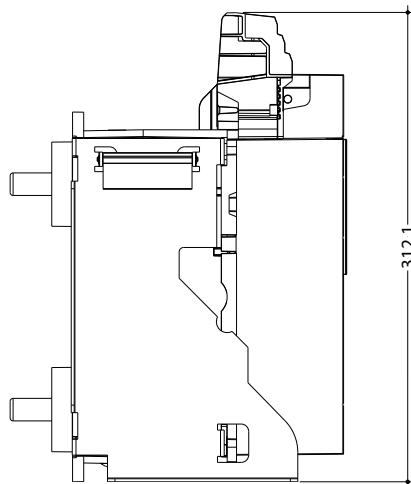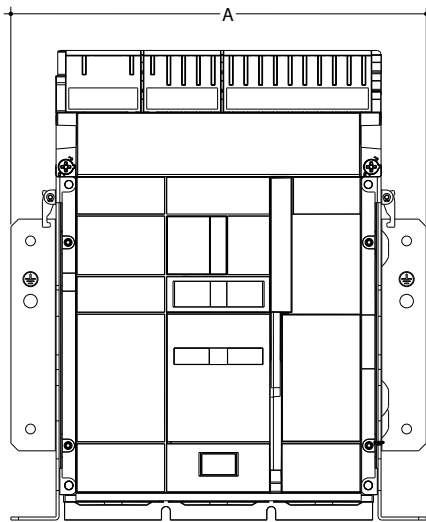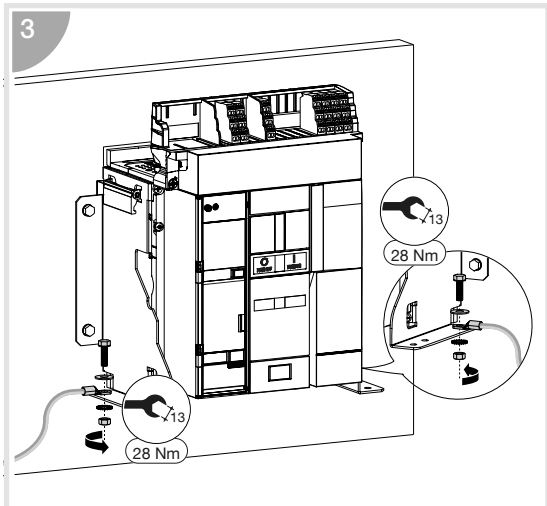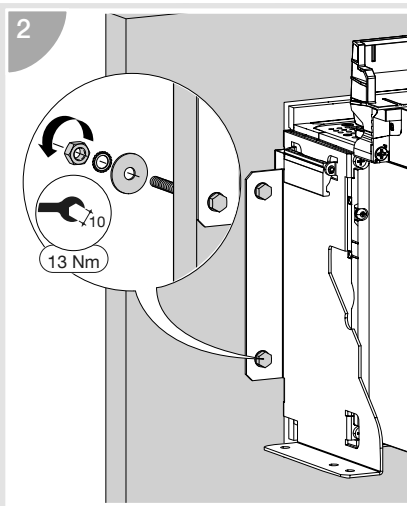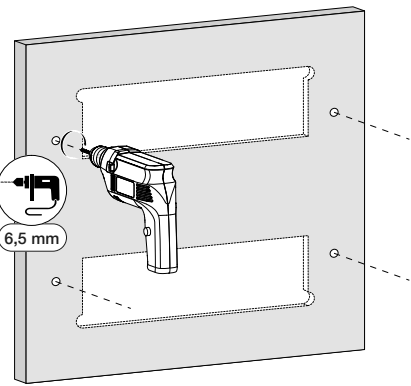

	3P	4P
A (mm)	276	346
B (mm)	43,5	113,5

