




476-015-001a

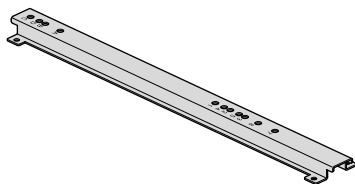


- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu

- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Montāžas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar
- (AR) دليل التركيب


Schrankschienenhalter UST5 Traverse pour support UST5 Traverse for UST5 support

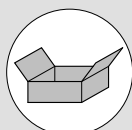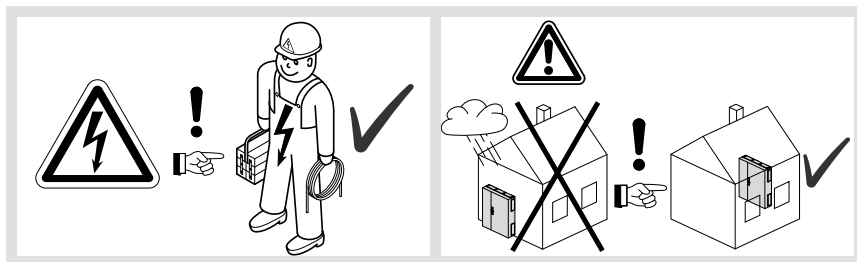


UST5-STT50; 776-018-005

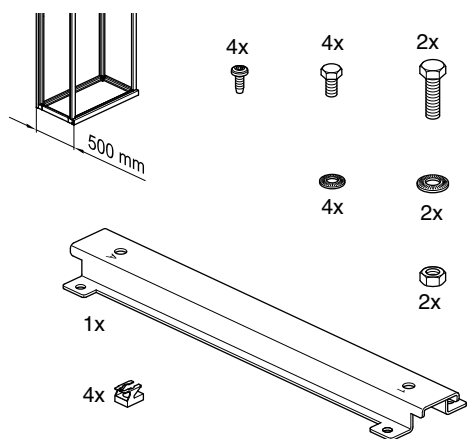



UST5-STT60; 776-018-006

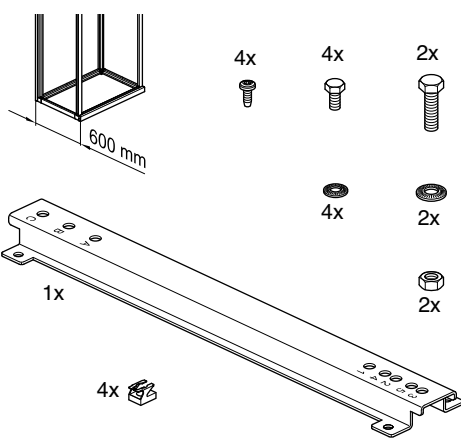

UST5-STT70; 776-018-007

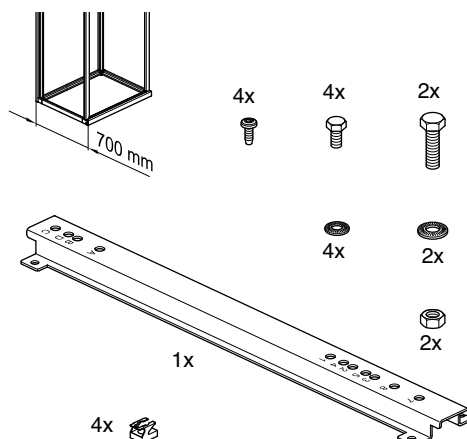



USR5-STT80; 776-018-008

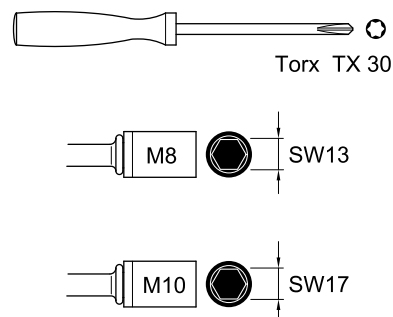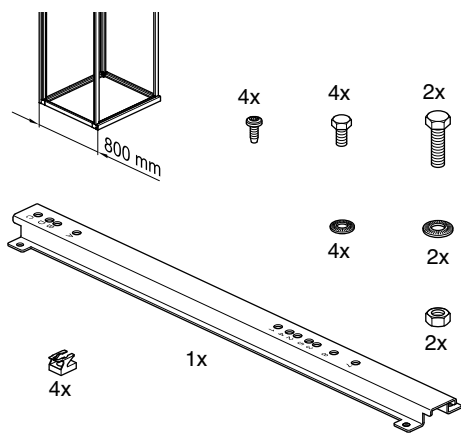


1

UST5-Träger	PhMA [mm]	UST5-SST50; 776-018-005	UST5-SST60; 776-018-006	UST5-SST70; 776-018-007 UST5-SST80; 776-018-008
UST5-112-301; 776-004-301	112,5	A1	A1	A1
UST5-112-302; 776-004-302				
UST5-112-303; 776-004-303				
UST5-112-401; 776-004-401				
UST5-112-402; 776-004-402				
UST5-112-403; 776-004-403	122,5		C3	C3
UST5-123-321; 776-005-321				
UST5-123-323; 776-005-323				
UST5-123-331; 776-005-331				
UST5-123-333; 776-005-333				
UST5-123-401; 776-005-401	135		B2	B2
UST5-123-403; 776-005-403				
UST5-135-301; 776-006-301				
UST5-135-303; 776-006-303				
UST5-135-401; 776-006-401				
UST5-135-403; 776-006-403	185			C7
UST5-185-301; 776-007-301				
UST5-185-302; 776-007-302				
UST5-185-303; 776-007-303				D6


2

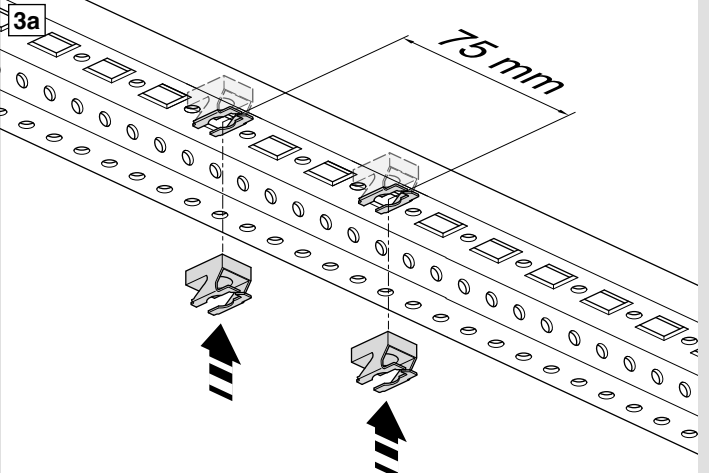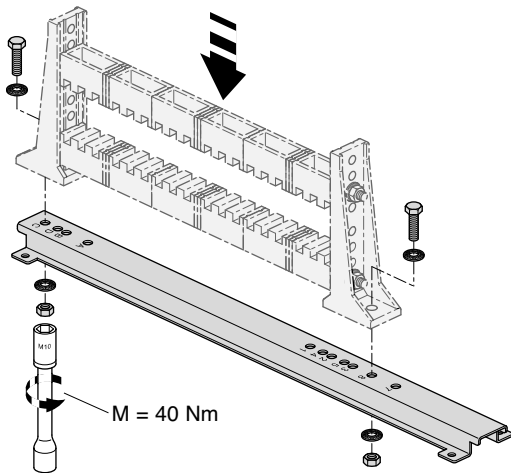

4a

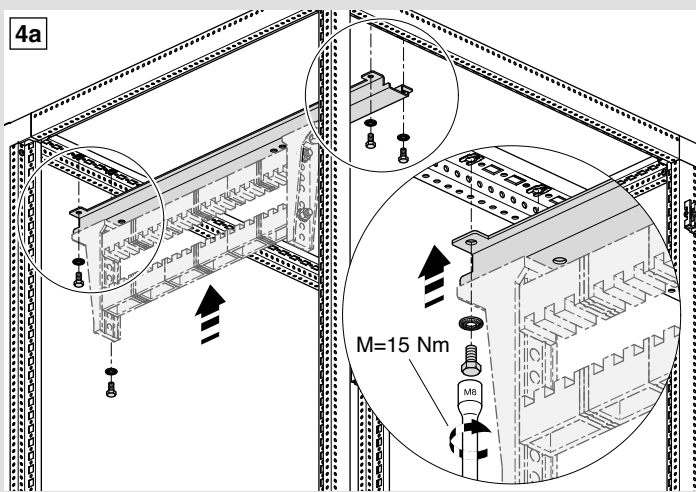

3b

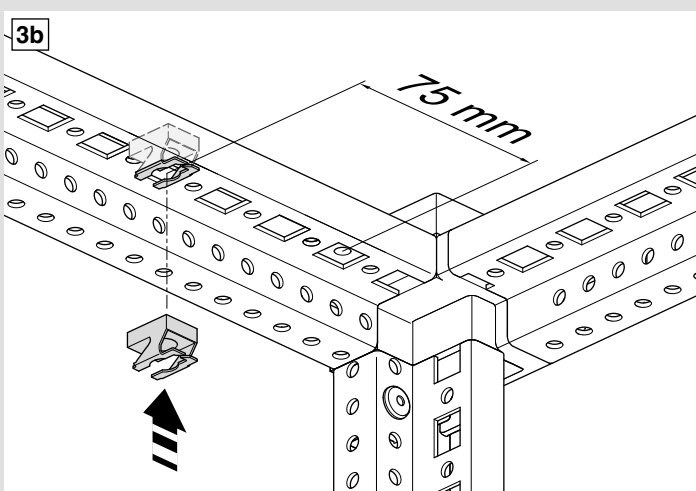

4b

