




476-015-002a

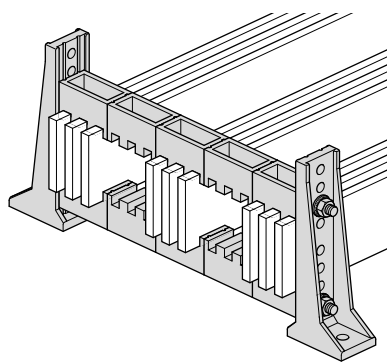


- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu

- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Montāžas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar
- (AR) دليل التركيب


Sammelschienenenträger UST5
Support de barres UST5
Bus bar support UST5

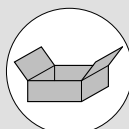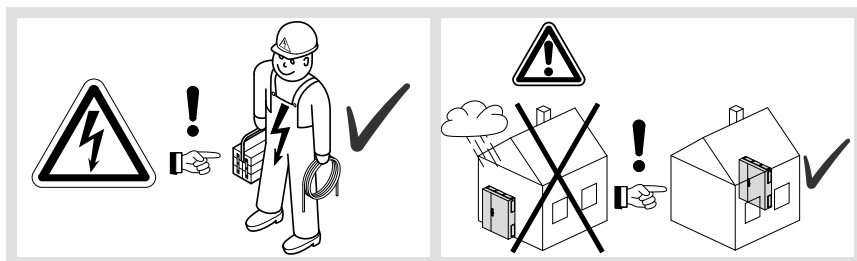


UST5-112; 776-004

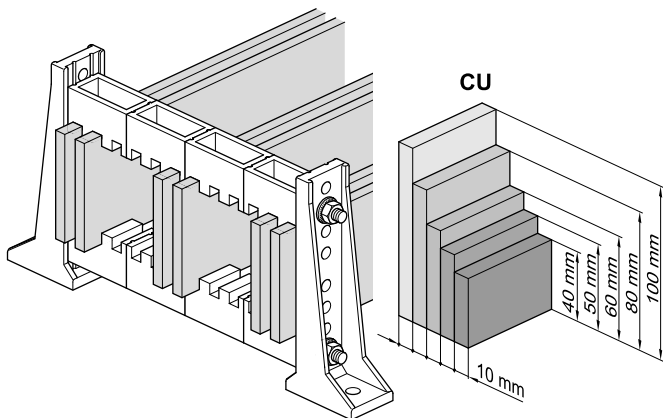

UST5-123; 776-005

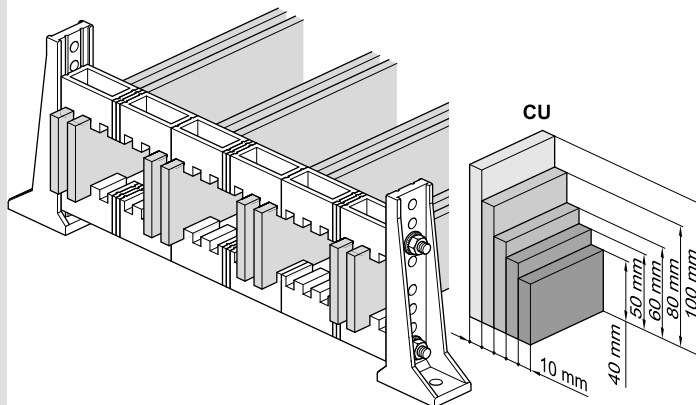

UST5-135; 776-006

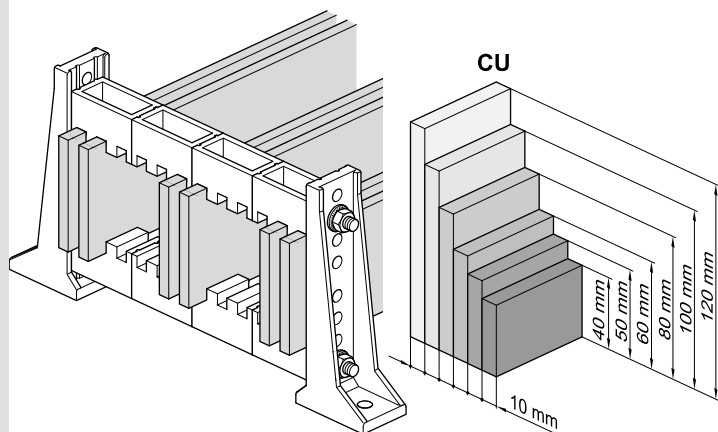


Torx TX 30



M8 SW13 SW16

M10 SW17 13







1a

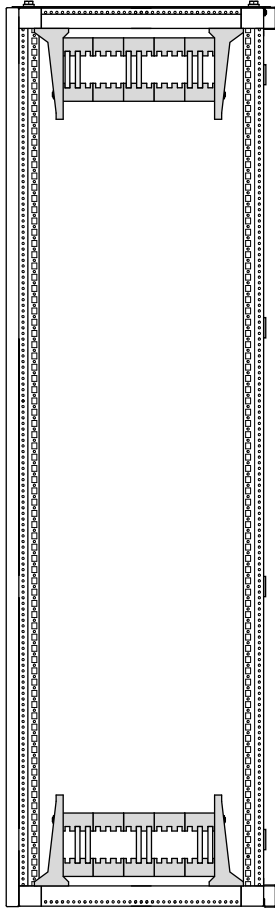


1b

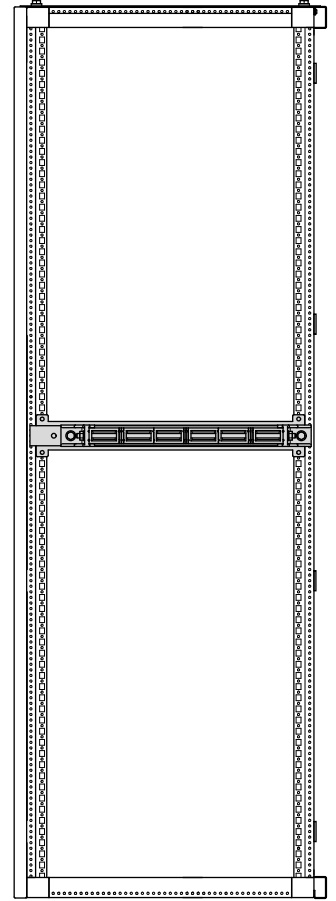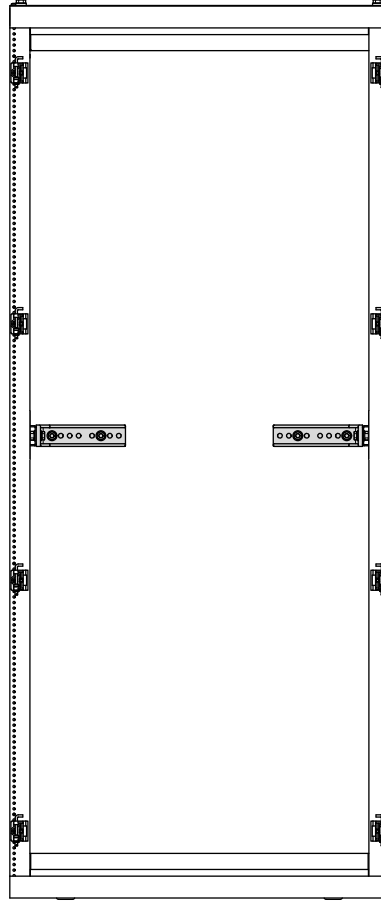



2

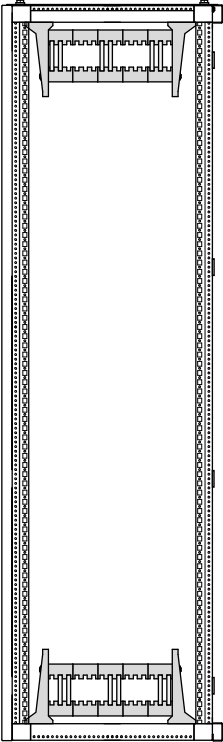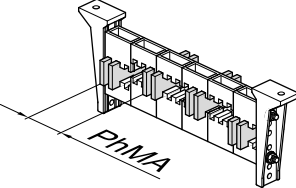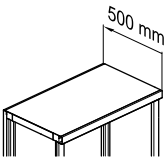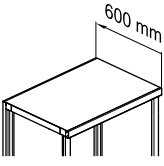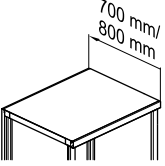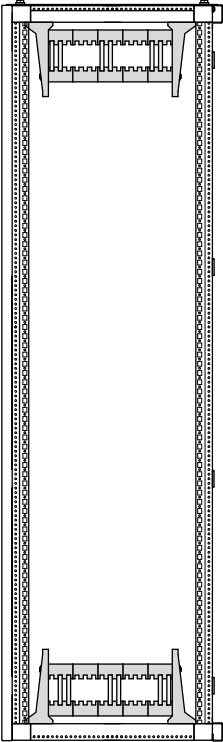	 PhMA	PhMA (mm)	500 mm	600 mm	700 mm/ 800 mm
					
	UST5-112-301; 776-004-301	112,5	X	X	X
	UST5-112-302; 776-004-302				
	UST5-112-303; 776-004-303				
	UST5-112-401; 776-004-401				
	UST5-112-402; 776-004-402				
	UST5-112-403; 776-004-403				
	UST5-123-321; 776-005-321	122,5		X	X
	UST5-123-323; 776-005-323				
	UST5-123-331; 776-005-331				
	UST5-123-333; 776-005-333				
	UST5-123-401; 776-005-401	135		X	X
	UST5-123-402; 776-005-402				
	UST5-135-301; 776-006-301				
	UST5-135-303; 776-006-303				
	UST5-135-401; 776-006-401	185			X
	UST5-135-403; 776-006-403				
UST5-185-301; 776-007-301					
UST5-185-302; 776-007-302					
UST5-185-303; 776-007-303				X	



4

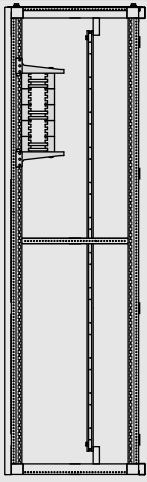



4a 3P / 112,5 / 2 x Cu

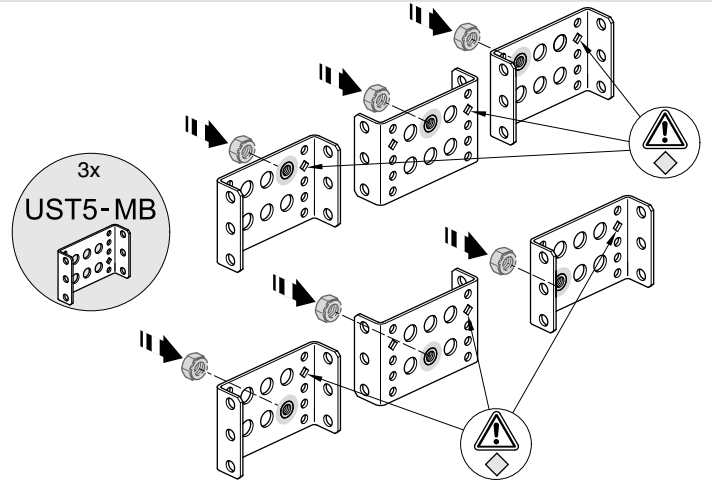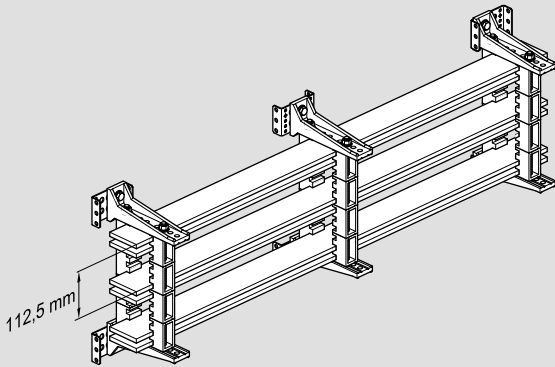



4b 4P / 112,5 / 2 x CU

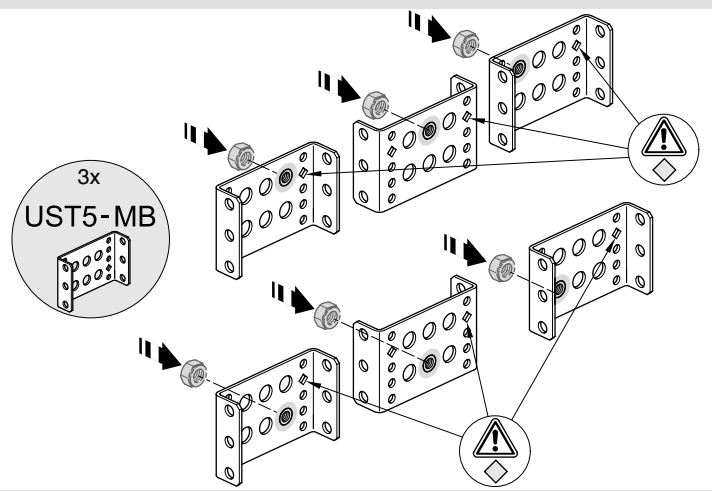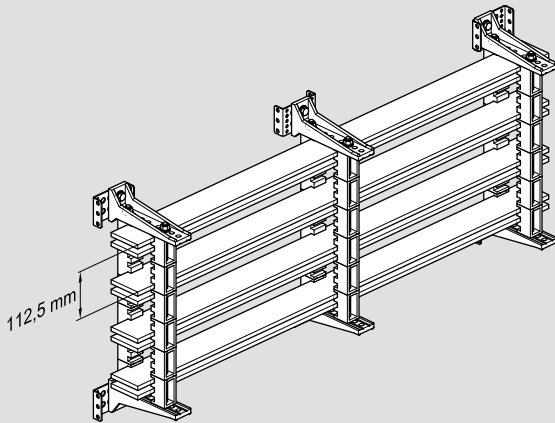



4c 4P / 112,5 / 3 x CU

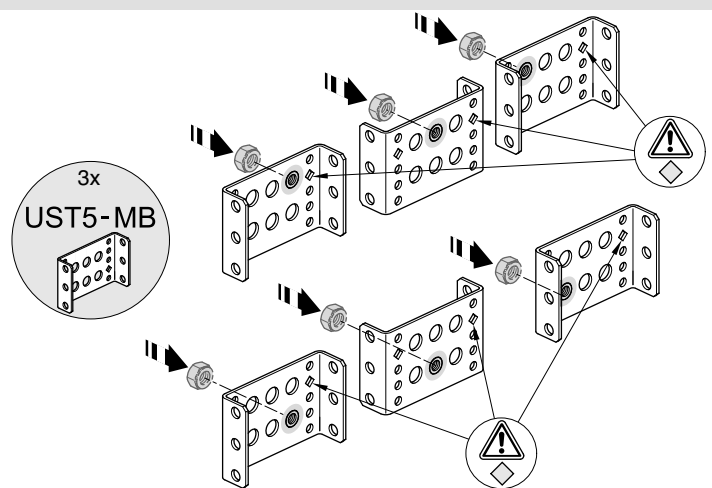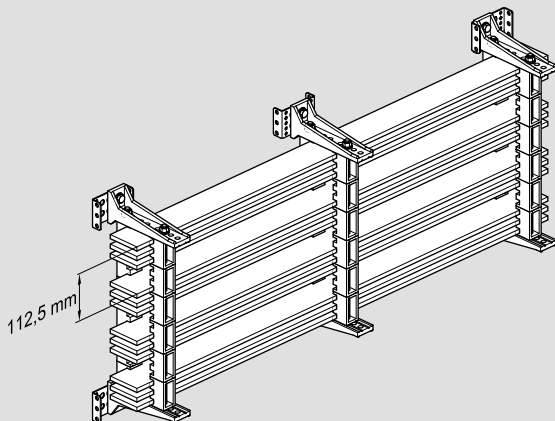



4d 3P / 122,5 / 2 x CU

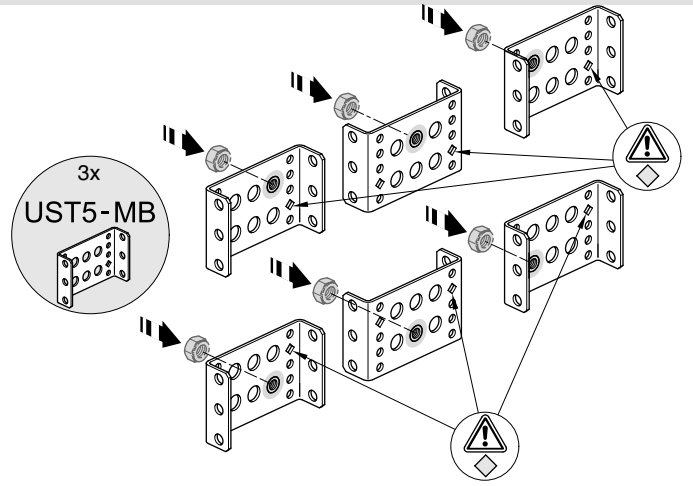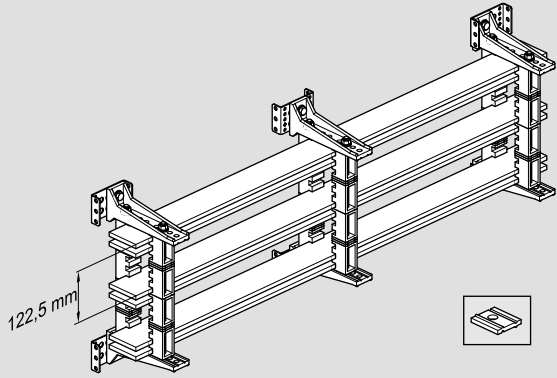



4e 3P / 122,5 / 3 x CU

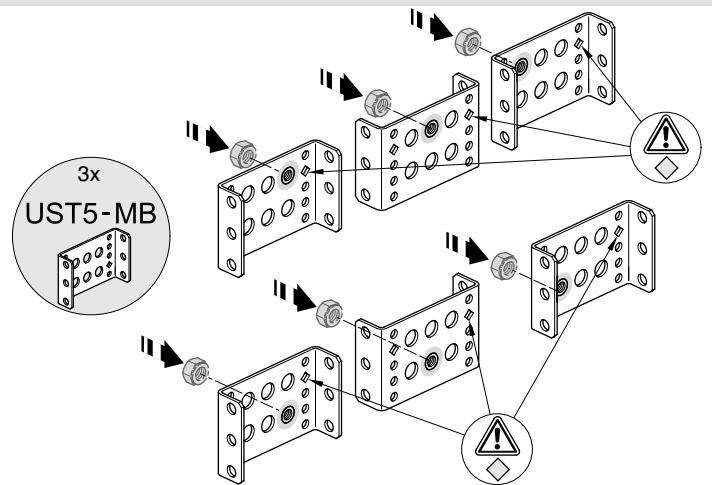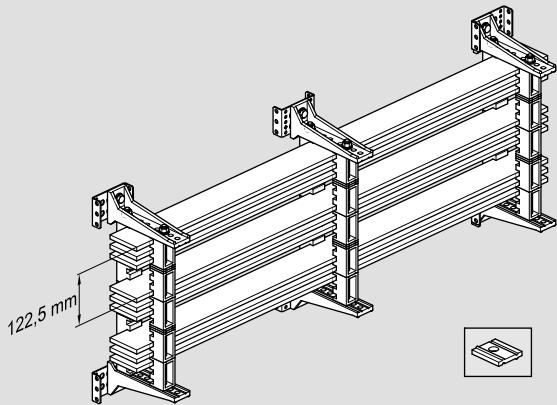



4f 4P / 122,5 / 2 x Cu

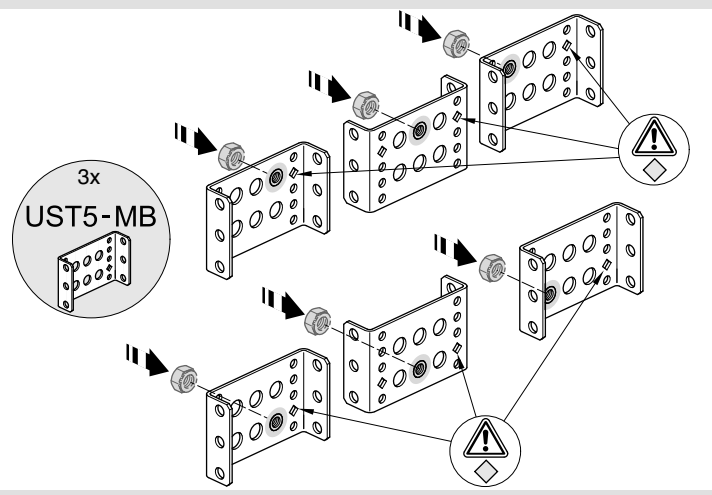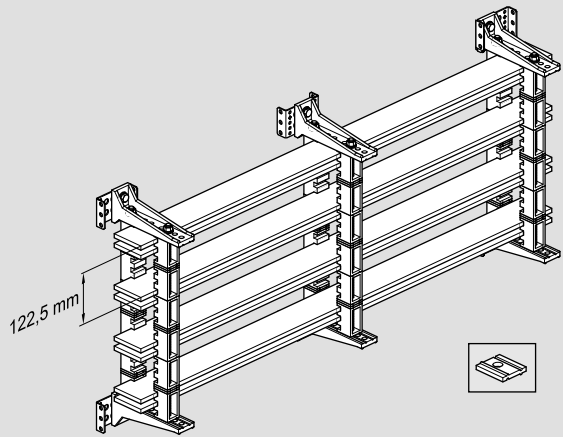



4g 4P / 122,5 / 3 x Cu

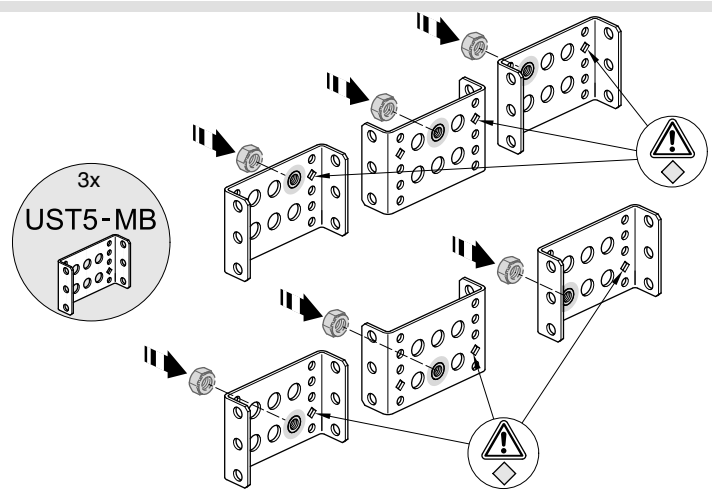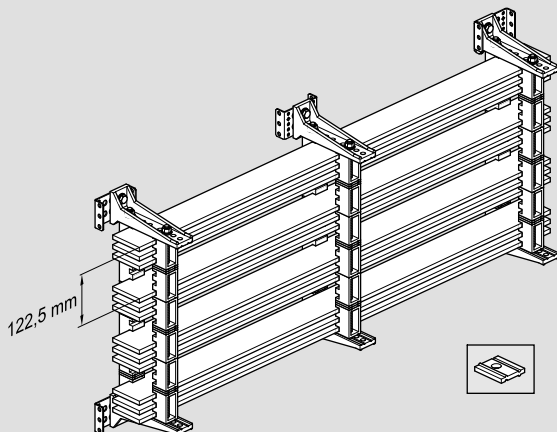



4h 3P / 135 2 x Cu

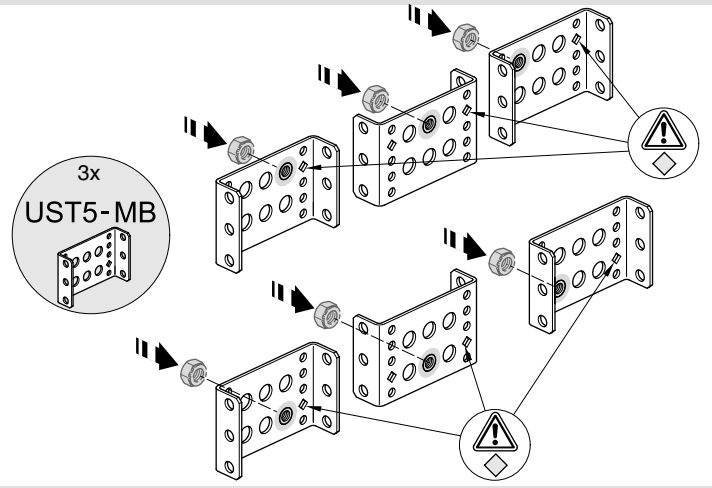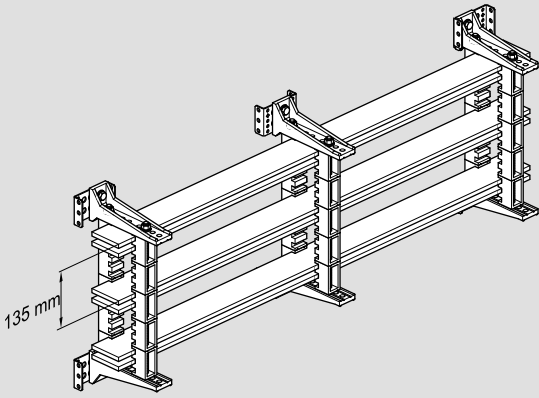



4i 3P / 135 / 3 x Cu








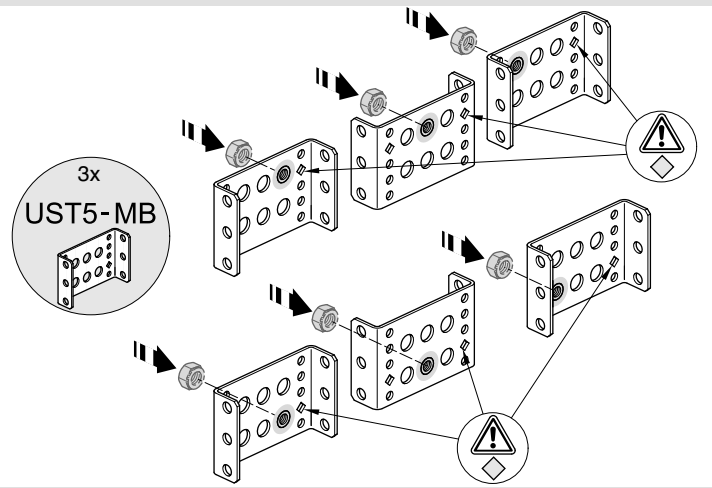
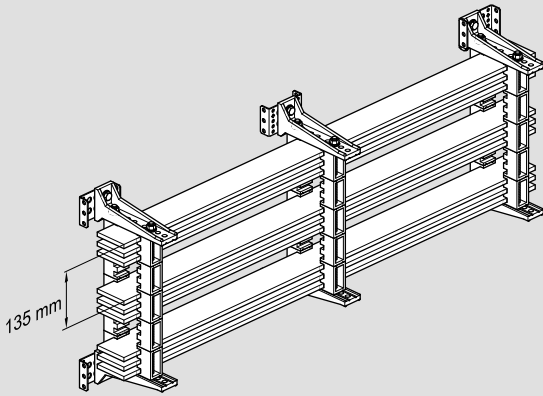


4j 4P / 135 / 2 x Cu

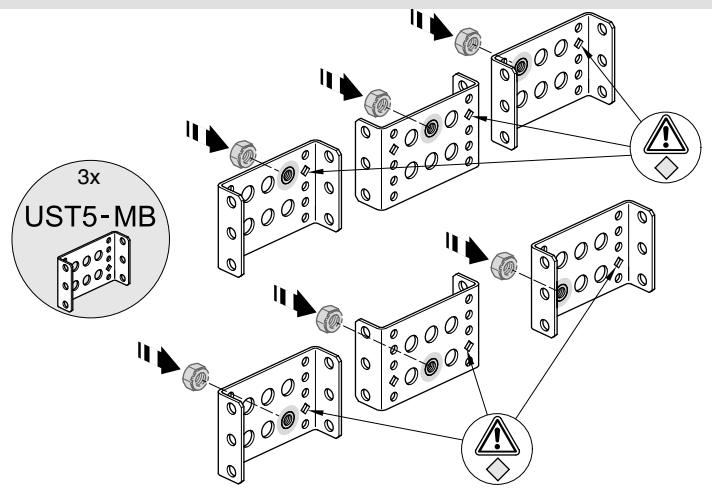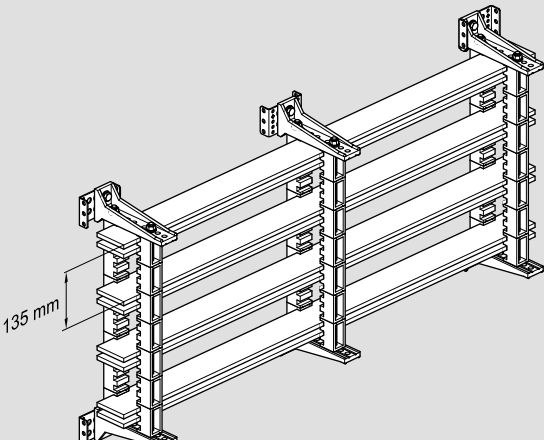

4k 4P / 135 / 3 x Cu

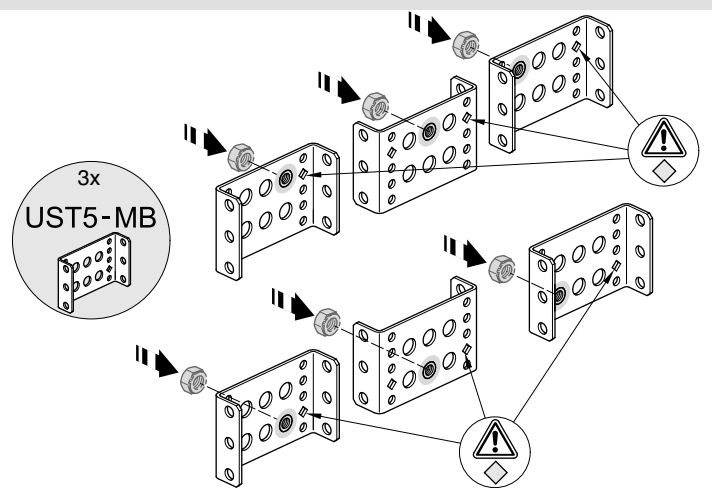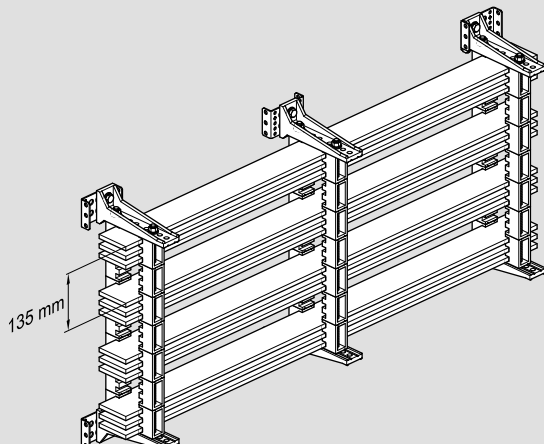


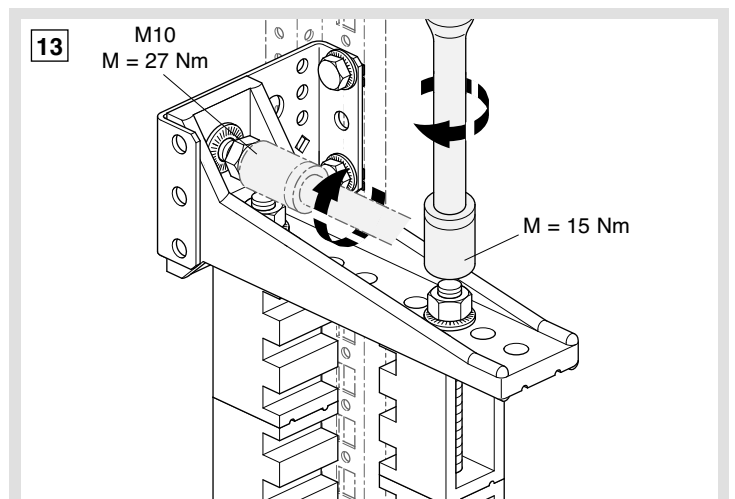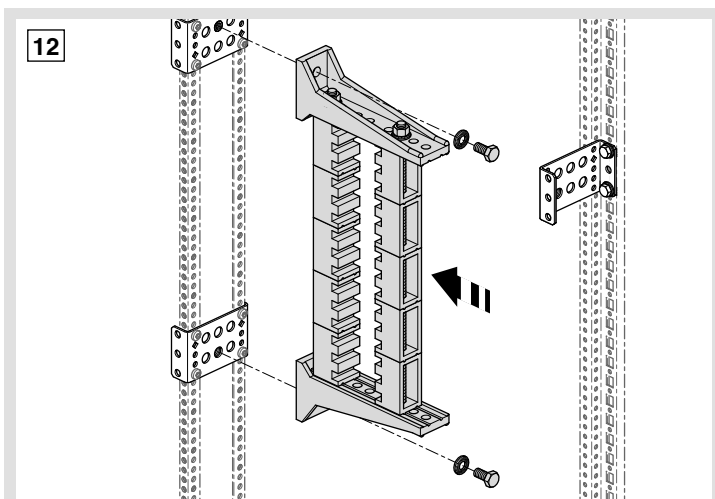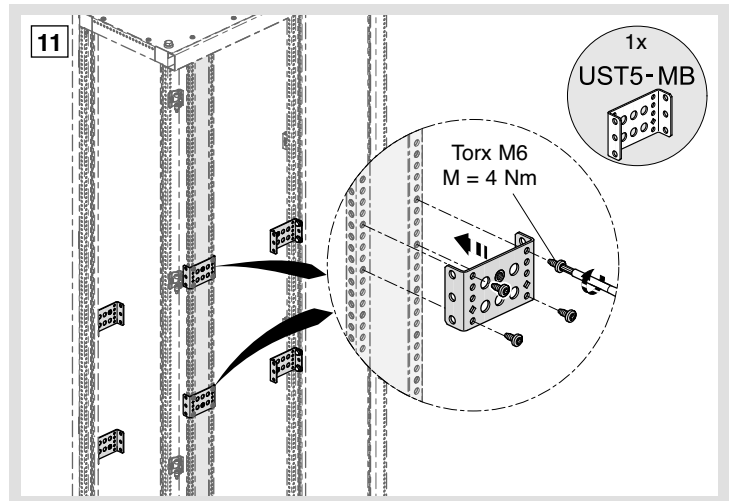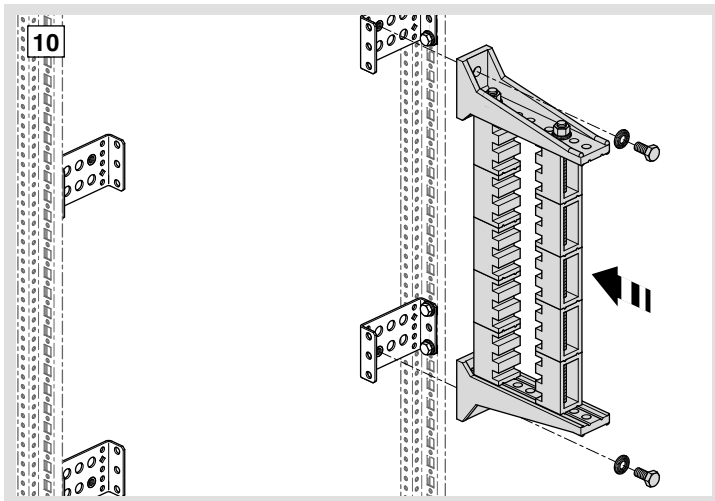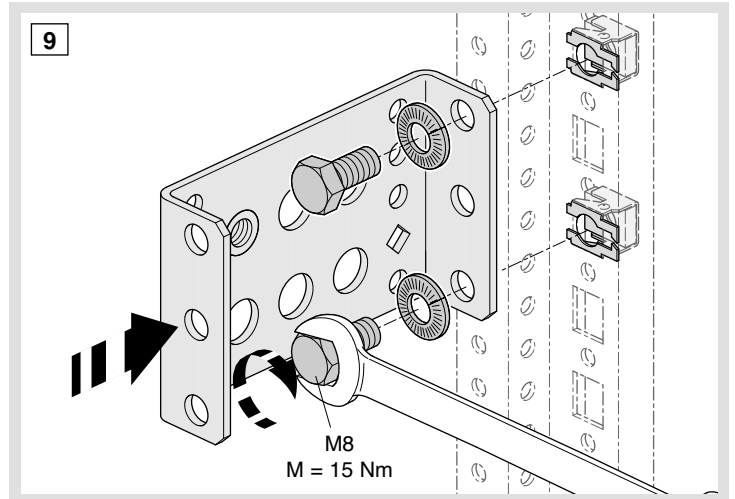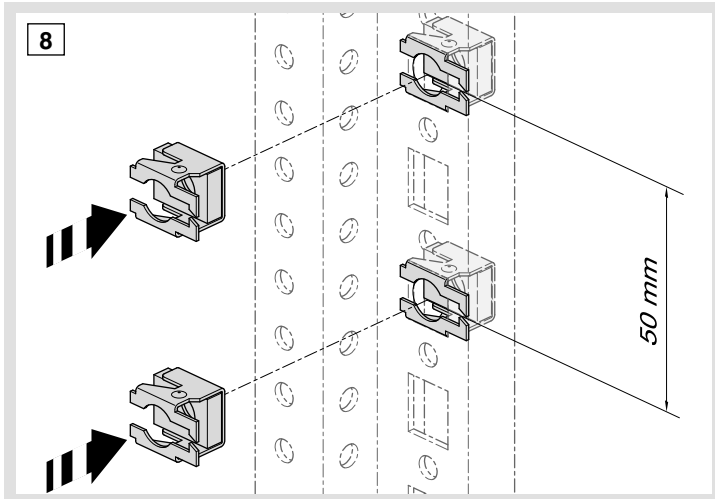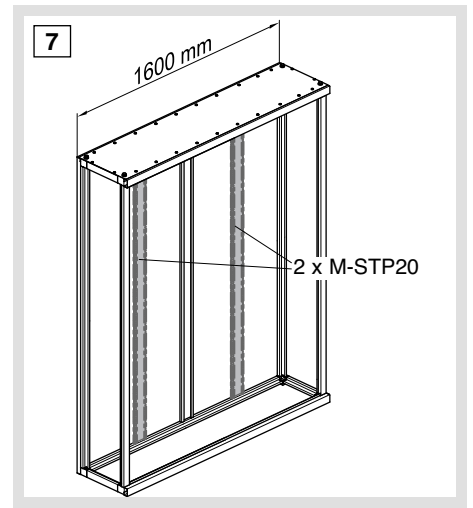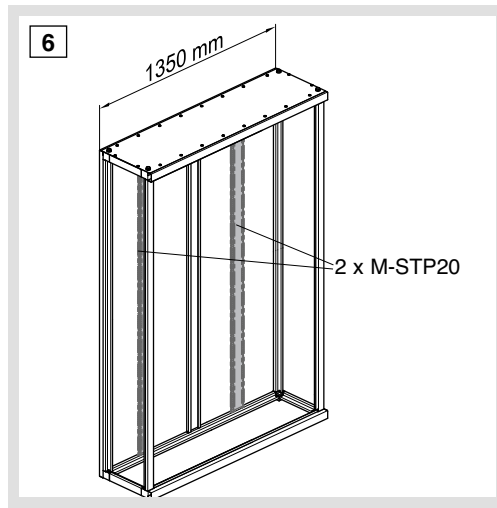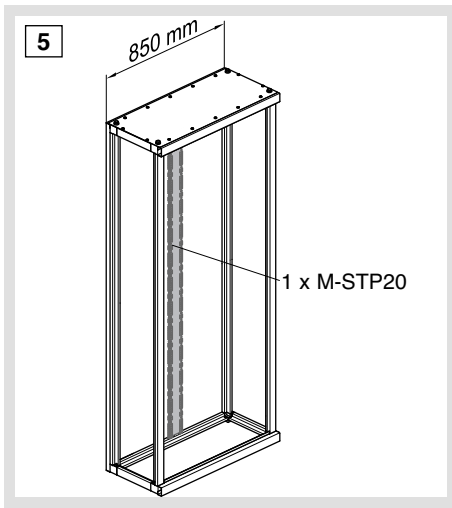


14

		CU
UST5-VS3M8-40	776-010-048	40 x 10 mm
UST5-VS3M8-50	776-010-058	50 x 10 mm
UST5-VS3M8-60	776-010-068	60 x 10 mm
UST5-VS3M8-80	776-010-088	80 x 10 mm
UST5-VS3M8-100	776-010-108	100 x 10 mm
UST5-VS3M8-120	776-010-128	120 x 10 mm


15a

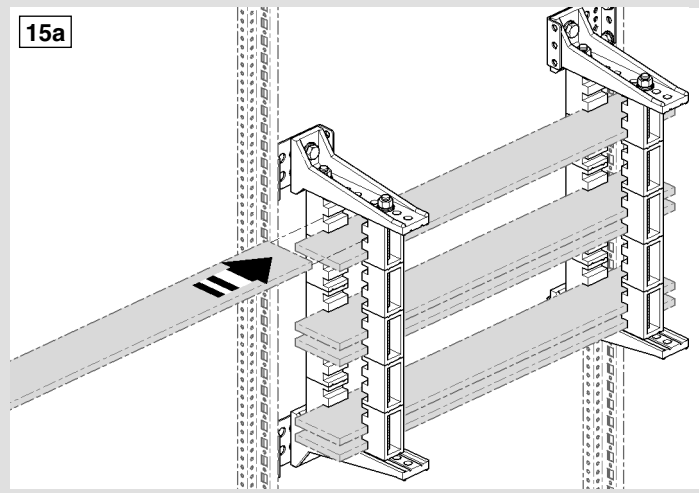


16a

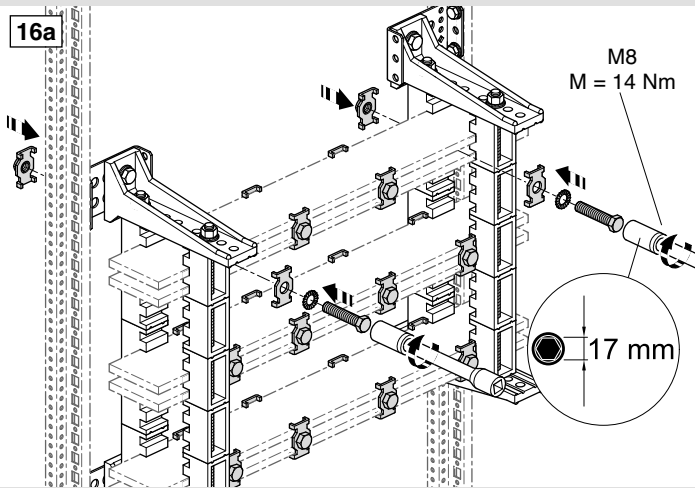


17a

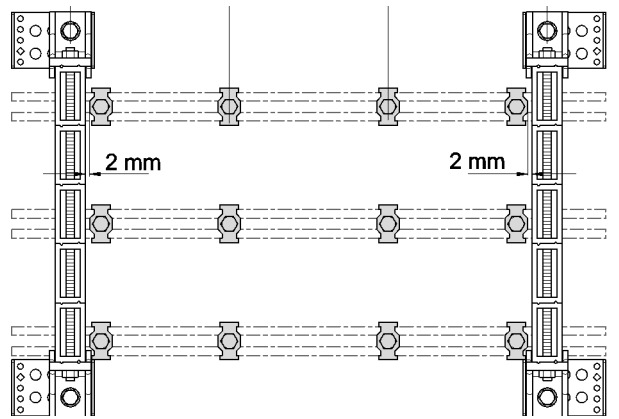


15b



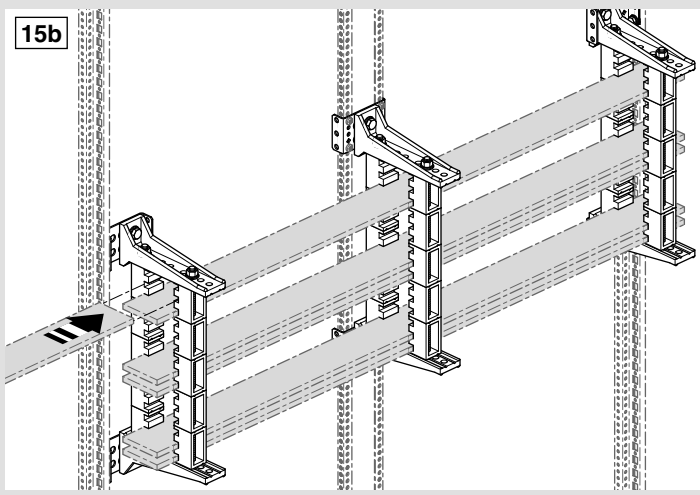


16b

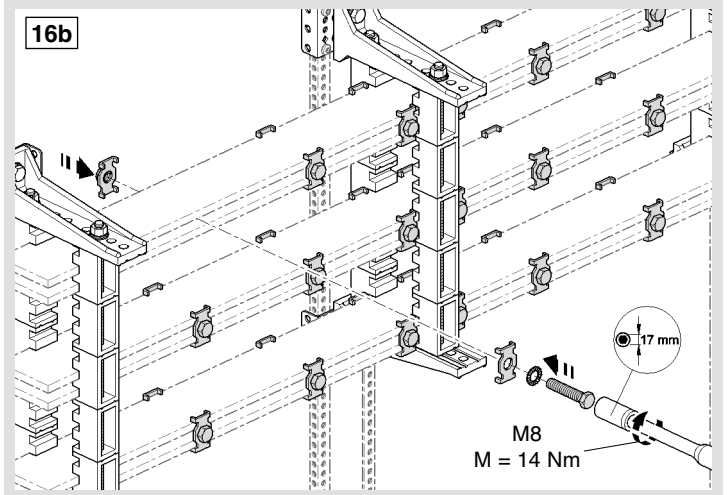

17b

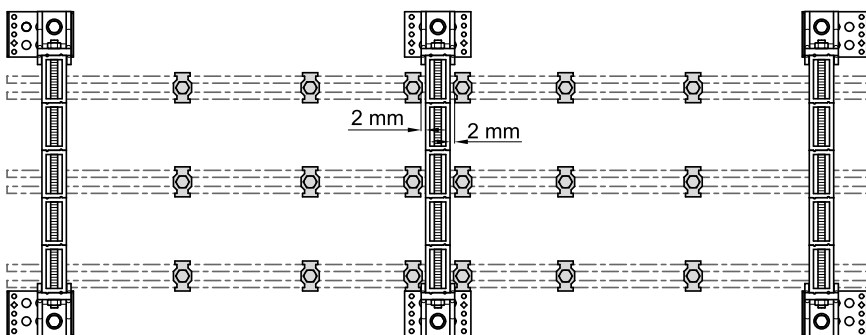

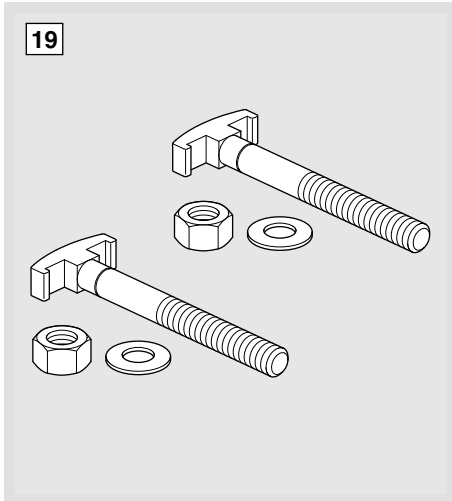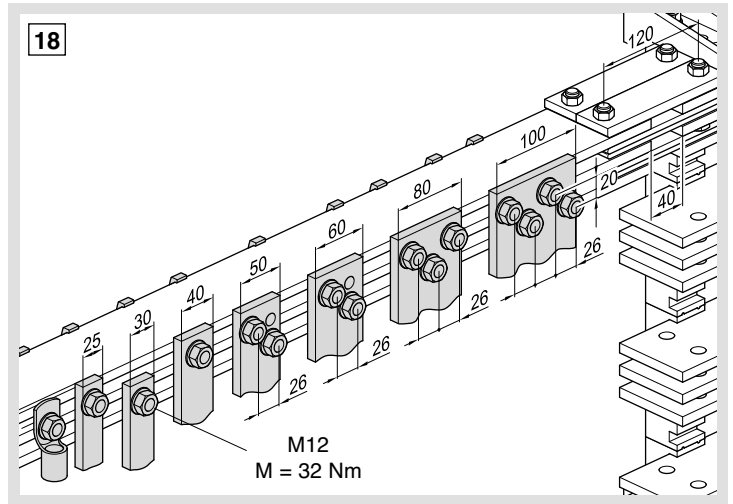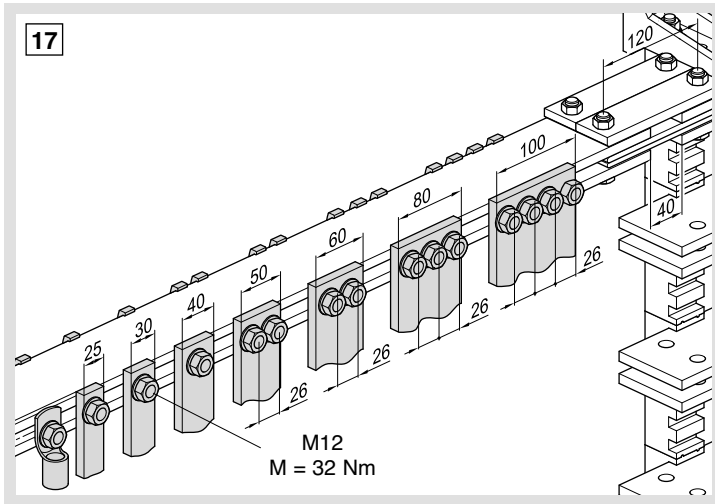

20

CU	a1	a2	a3	a4
40 x 10 mm	70 mm	80 mm	90 mm	112 mm
50 x 10 mm	80 mm	90 mm	102 mm	120 mm
60 x 10 mm	90 mm	102 mm	112 mm	132 mm
80 x 10 mm	112 mm	120 mm	132 mm	150 mm
100 x 10 mm	132 mm	150 mm	150 mm	172 mm
120 x 10 mm	150 mm	170 mm	170 mm	190 mm

21

M12 x 50	776-024-050	HKS1250
M12 x 60	776-024-060	HKS1260
M12 x 70	776-024-070	HKS1270
M12 x 80	776-024-080	HKS1280
M12 x 90	776-024-090	HKS1290
M12 x 102	776-024-102	HKS12102
M12 x 112	776-024-112	HKS12112
M12 x 120	776-024-120	HKS12120
M12 x 132	776-024-132	HKS12132
M12 x 150	776-024-150	HKS12150
M12 x 170	776-024-170	HKS12170
M12 x 190	776-024-190	HKS12190

