


## Technical specifications

### 4 pole distribution block 125A – 7 modules – 4 x 12 connections – KJ125C

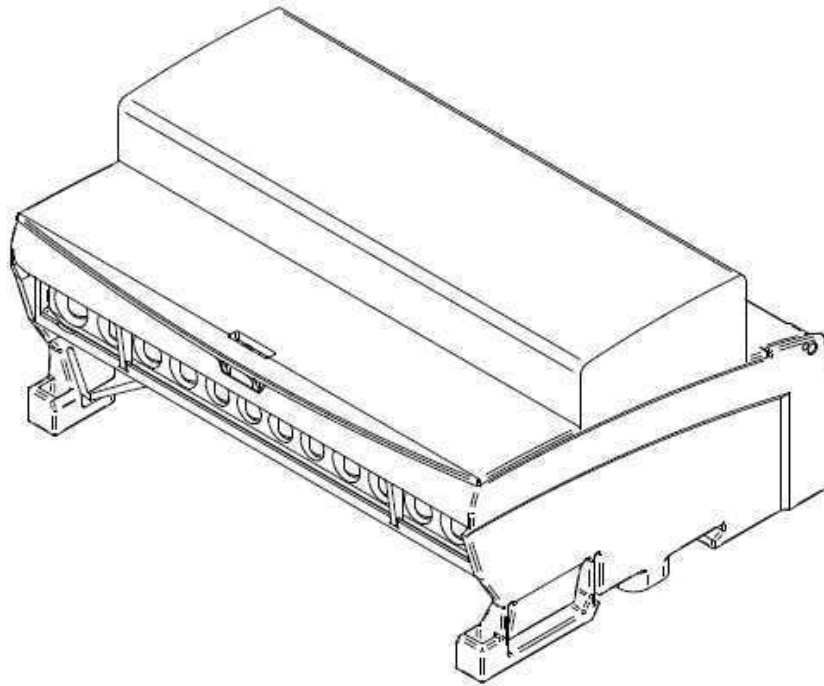

Picture for information only

	Rigid	Flexible with ferrule	Screw	Torque
1 x Ø9mm	10 - 35 mm <sup>2</sup>	4 - 25 mm <sup>2</sup>	Slotted + PZ2	2,5 N.m
7 x Ø7.5mm	2.5 - 25 mm <sup>2</sup>	1.5 - 16 mm <sup>2</sup>	Slotted + PZ2	2 N.m
4 x Ø6.5mm	1.5 - 16 mm <sup>2</sup>	1.5 - 10 mm <sup>2</sup>	Slotted + PZ2	2 N.m

Nominal current: 125A

Width: 126 mm (7 modules)

Weight 420 g

Heat rise: 44°K

Short-circuit withstand:

I<sub>cw</sub>: 4 200A

I<sub>pk</sub>: 26 kA

EN 60998

IEC 60947-7-1