



(EN)

Residual current operated
circuit-breaker RCBO
with switched neutral
6 to 32A

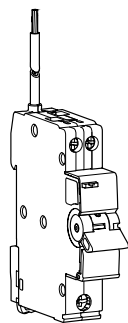


This device is to be installed only by a professional electrician fitter according to local applicable installation standards. Do not plug in or unplug this product when it is live. Conform to TBTS installation rules.

Electrical connection



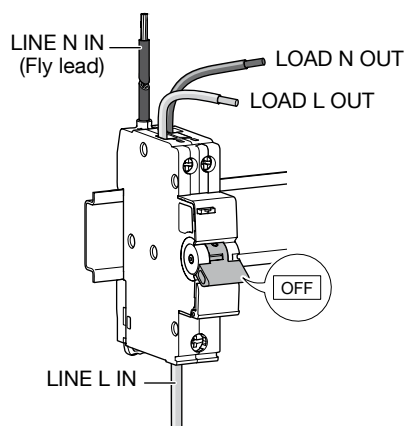


230/240V~50Hz

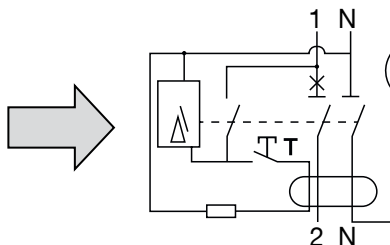

	LINE	LOAD
(mm ²)	1 to 16 2 x 10	1 to 16 2 x 6
	12 mm	10 mm
	⊕ PZ2	⊕ PZ2
	2,1 Nm	1,9 Nm



Easy dismounting with the plastic DIN rail clip

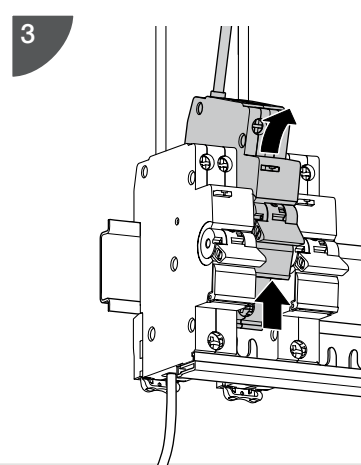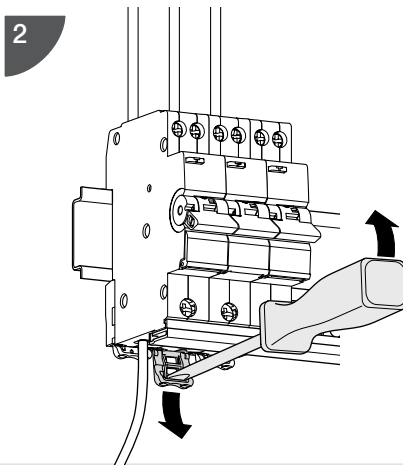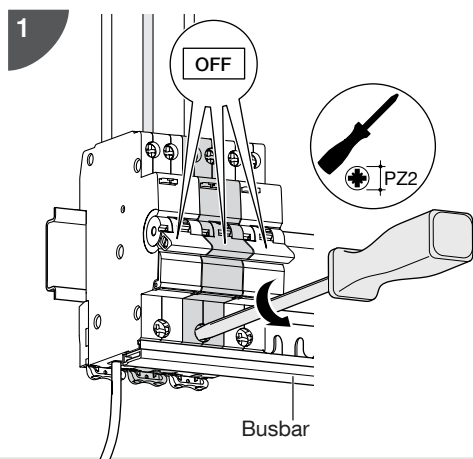


Locking device for handle MZN175



RCBO 1 module suitable for
DIN rail mount & Invicta panel board

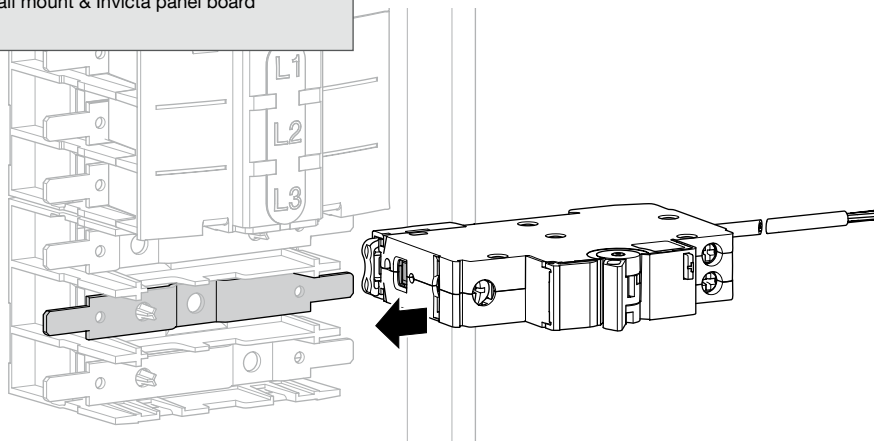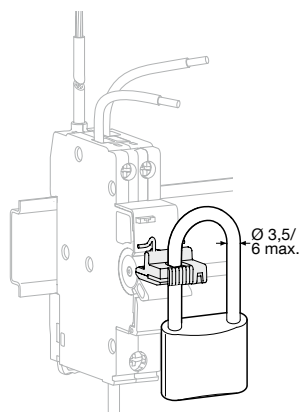

TEST

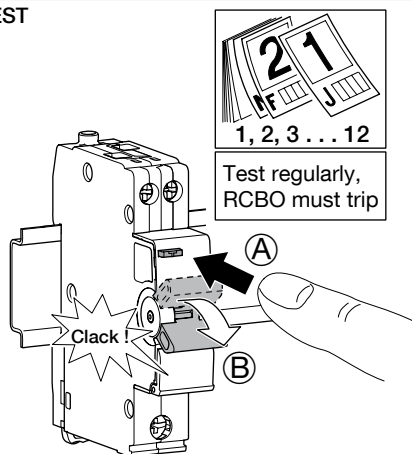

IR TEST

