


- ⓁⒺ Verriegelung für schütze
- ⓁⒺ Mechanical interlock
- ⓁⒺ Interverrouillage mécanique
- ⓁⒺ Bloccaggio meccanico
- ⓁⒺ Encravamento mecanico
- ⓁⒺ Enclavamiento mecanico

EVA101 / EVA102 / EVA103 / EVA104



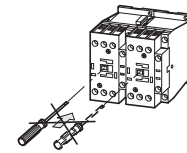


Do not operate simultaneously interlocked contactors





EVA101 / EVA102 / EVA103 / EVA104

EVA101	EVA102	EVA103	EVA104
<p>x1</p> <p>x2</p>	<p>x1</p> <p>x2</p> <p>x2</p> <p>Ø 4,8 mm (x2)</p>	<p>x1</p> <p>x2</p> <p>x2</p> <p>Ø 7 mm (x2)</p>	<p>x2</p> <p>x1</p> <p>Ø 8 mm</p> <p>x8</p> <p>M6 x 16</p> <p>x2</p> <p>M6 x 20</p> <p>x10</p> <p>M6</p>





EVA101

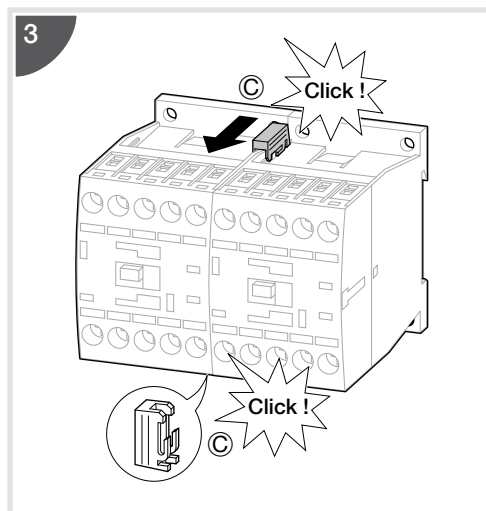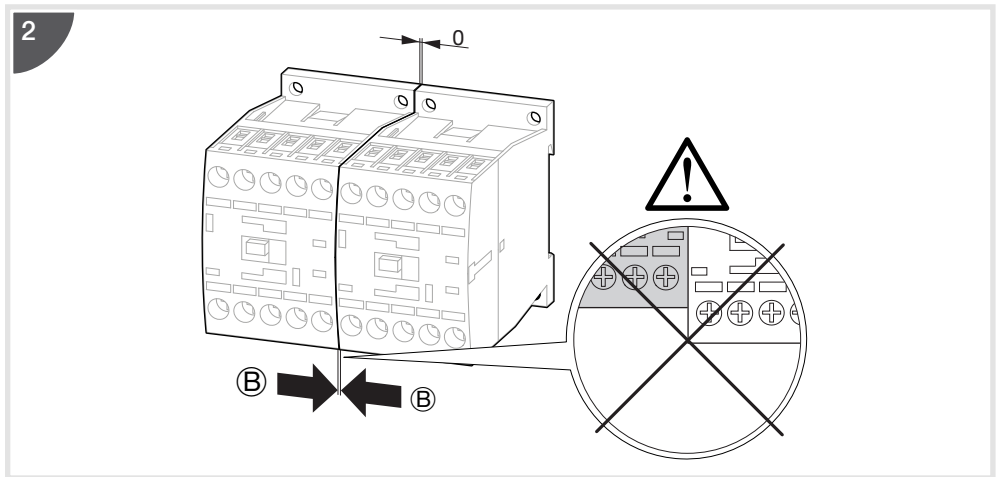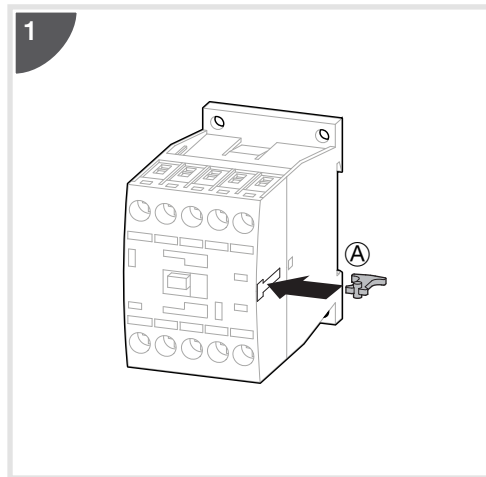


EVA102

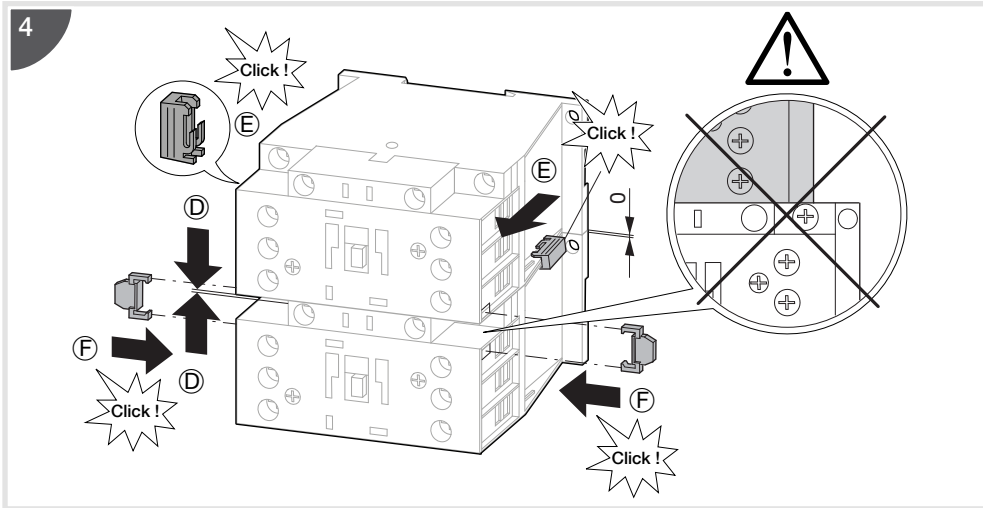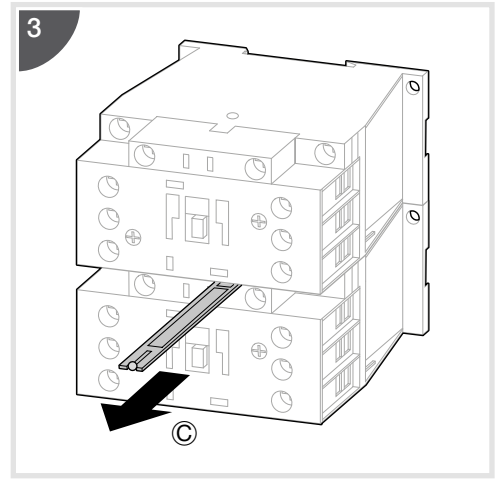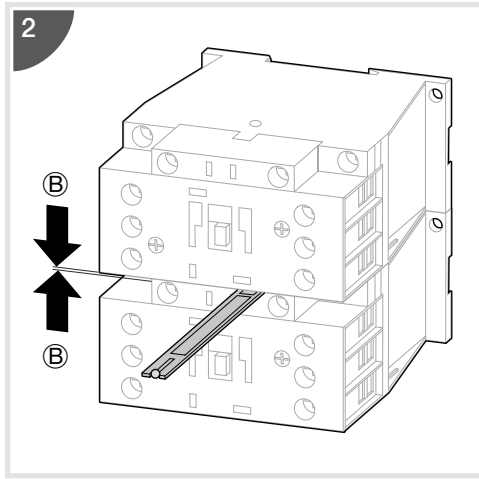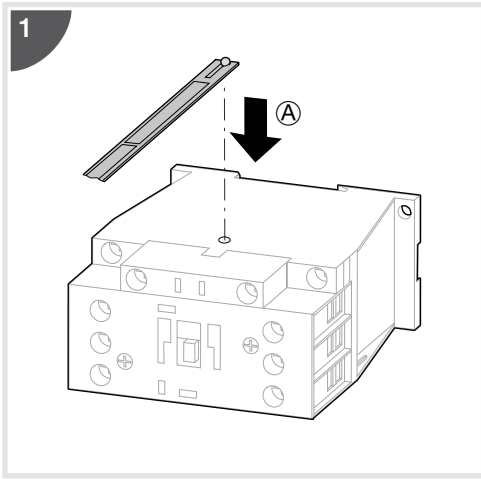


EVA103

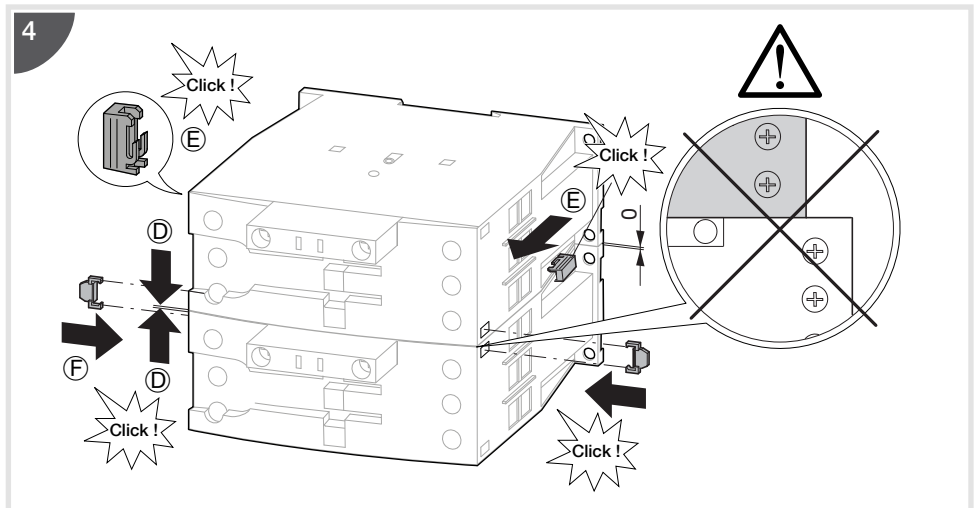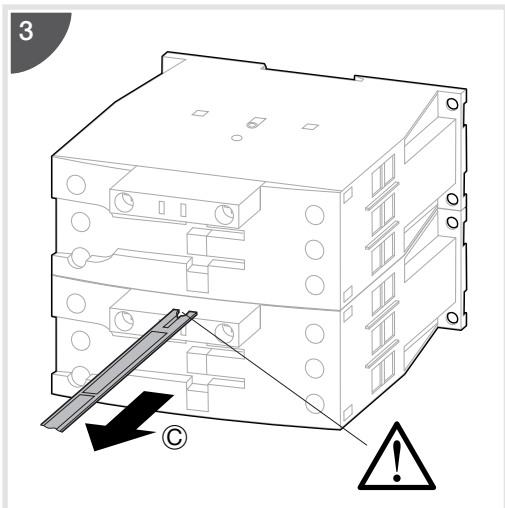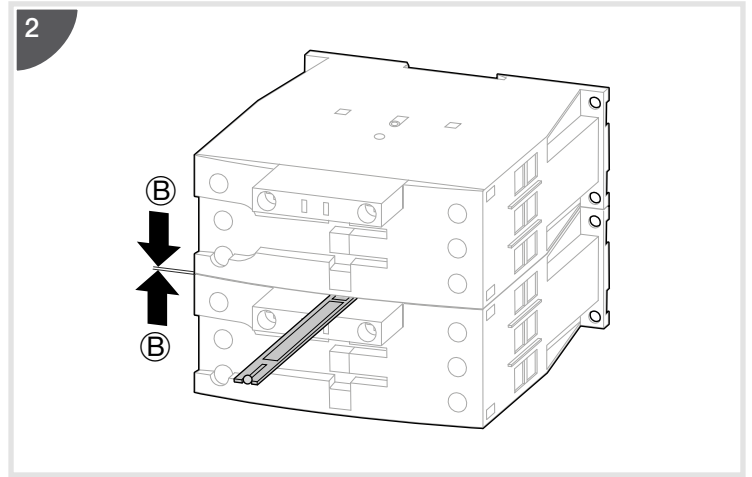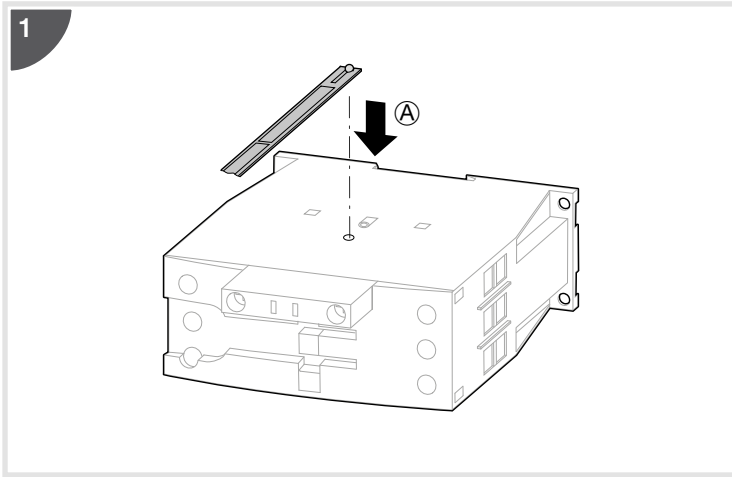


1a

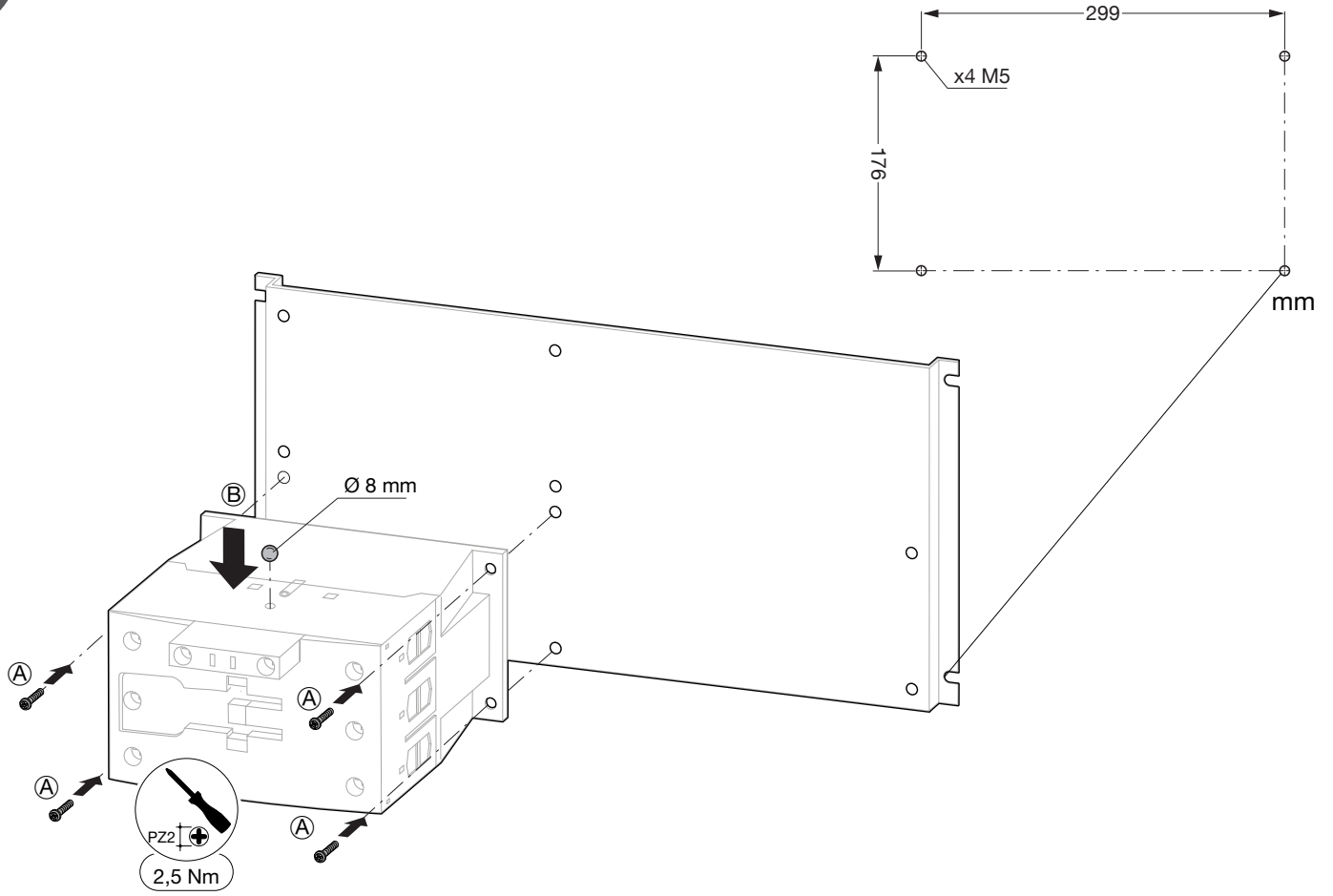

1b

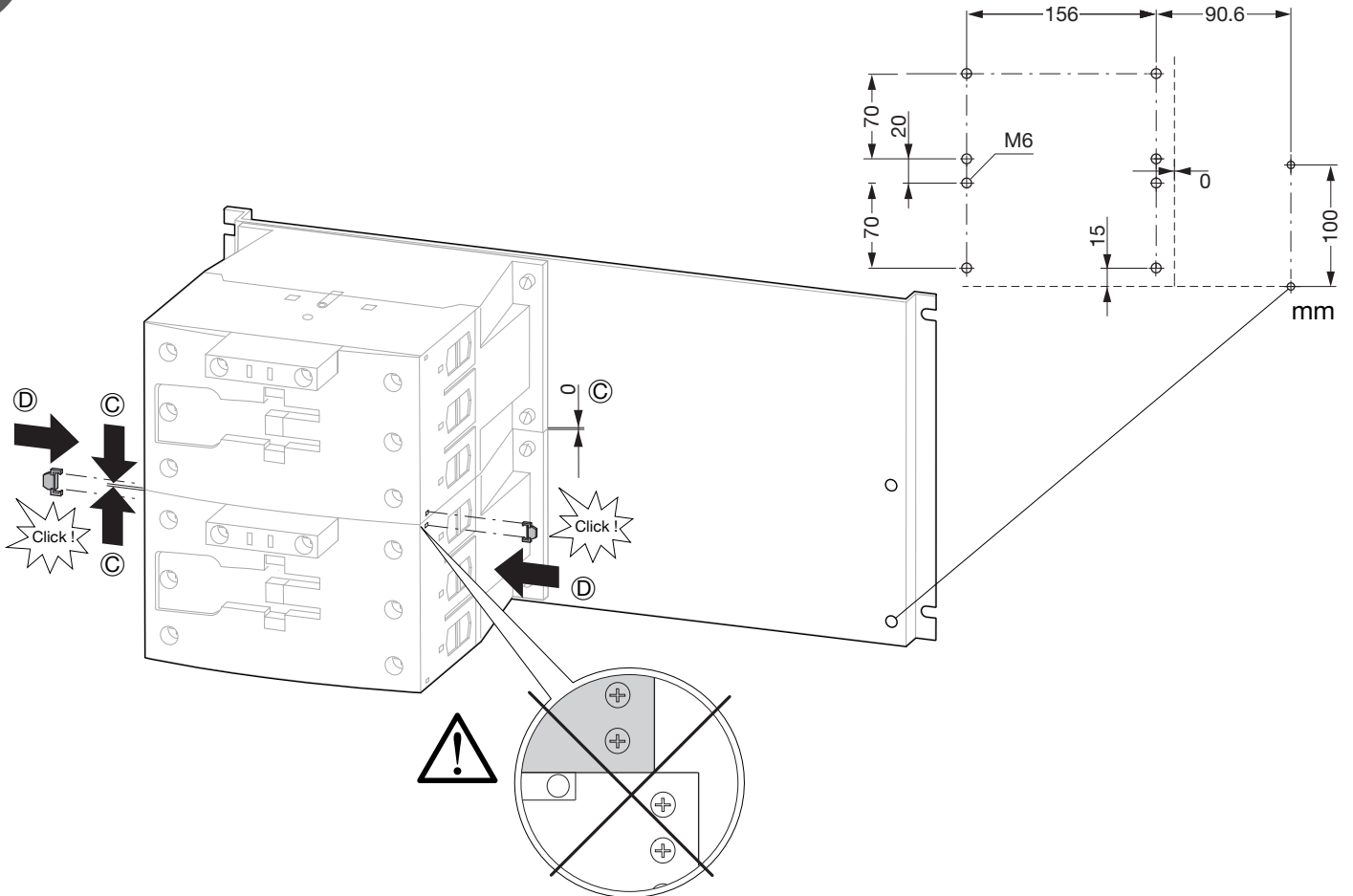

2a

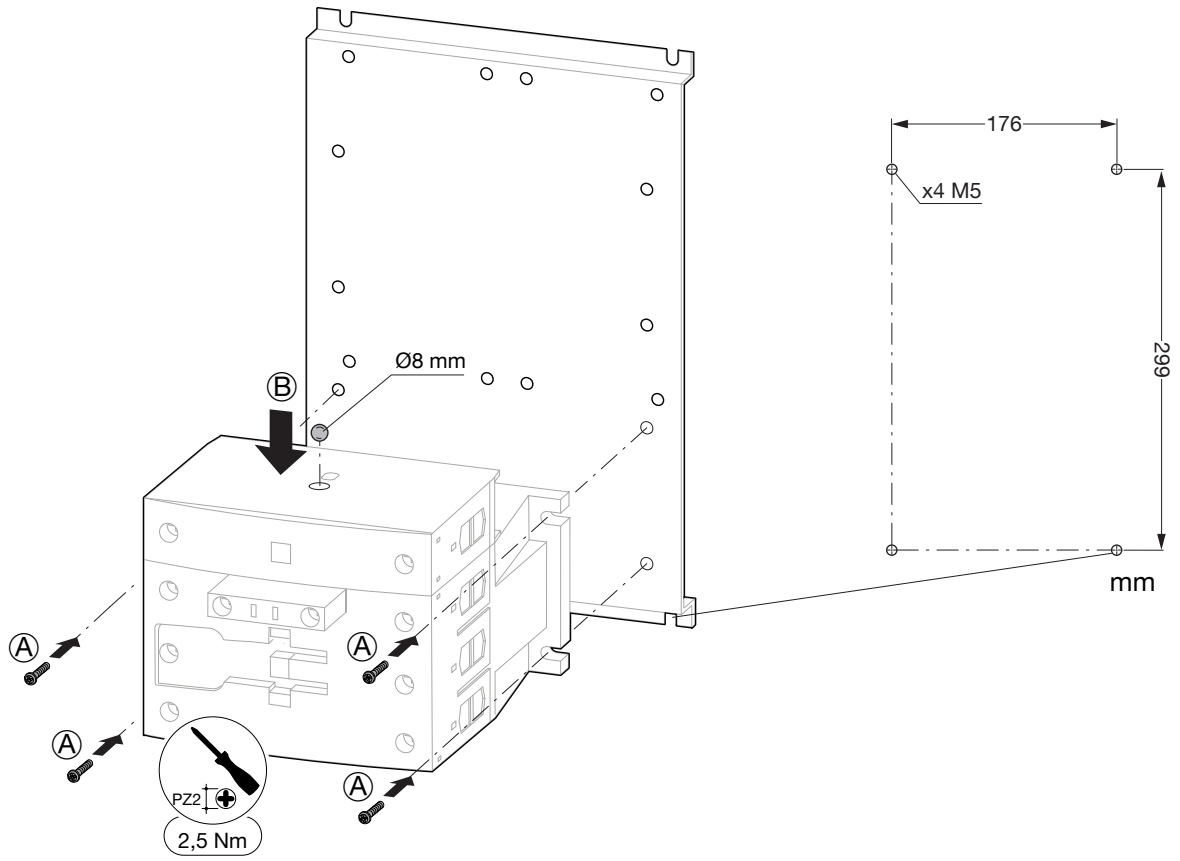

2b

