

# 2 module RCBO 10kA, C curve

**Catalogue numbers:**  
**ACA5xxT, ADA5xxT**

**Specifications:**

**Regulatory**

- Approval AS/NZS 61009.1
- 

**Electrical**



- Thermal trip characteristic - C curve (5-10xIn)
- Breaking capacity - 10,000A
- Voltage rating - 240V AC
- Current rating - 6 - 32A
- Residual current - 10mA/30mA (Type A)

**Mechanical**

- Number of operations - 1000
- Connection capacity:
  - Rigid conductor - 25mm<sup>2</sup> max.
  - Flexible conductor - 16mm<sup>2</sup> max.
- Bi-connect allowing two terminal connection points

**Accessories**

- Toggle locking kit - MZN175
- Auxiliary switch - MZ201
- Alarm switch - MZ202
- AC shunt trip - MZ203
- AC undervoltage - MZ206
- Combination auxiliary & alarm - CZ001

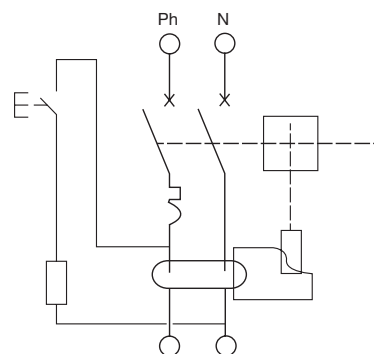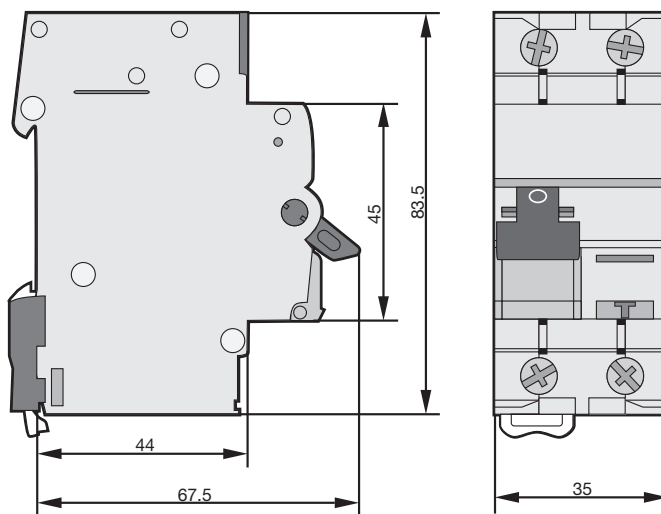

## References

Catalogue reference	Residual current I <sub>rn</sub>	Current rating (A)	Width in 17.5mm
ACA560T	10mA	10	2
ACA563T	10mA	13	2
ACA566T	10mA	16	2
ADA556T	30mA	6	2
ADA560T	30mA	10	2
ADA563T	30mA	13	2
ADA566T	30mA	16	2
ADA570T	30mA	20	2
ADA575T	30mA	25	2
ADA582T	30mA	32	2