

1 module RCBO 6kA, C curve

Catalogue numbers:
ACA1xxT

Specifications:

- BS style suitable for panelboards

Regulatory

- Approval AS/NZS 61009.1



Electrical



- Thermal trip characteristic - C curve (5-10xIn)
- Breaking capacity - 6,000A
- Voltage rating - 240V AC
- Current rating - 6-32A
- Residual current - 10mA (type A)

Mechanical

- Number of operations - 2000
- Connection capacity:
 Rigid conductor - 25mm² max.
 Flexible conductor - 16mm² max.
- Bi-connect allowing two terminal connection points and Neutral Bypass for the busbar
- Earth fault indication window
- Tightening torque 2.1Nm

Accessories

- Toggle locking kit - MZN175

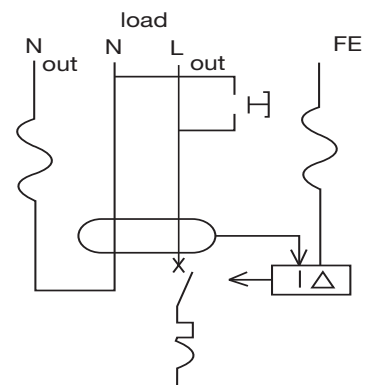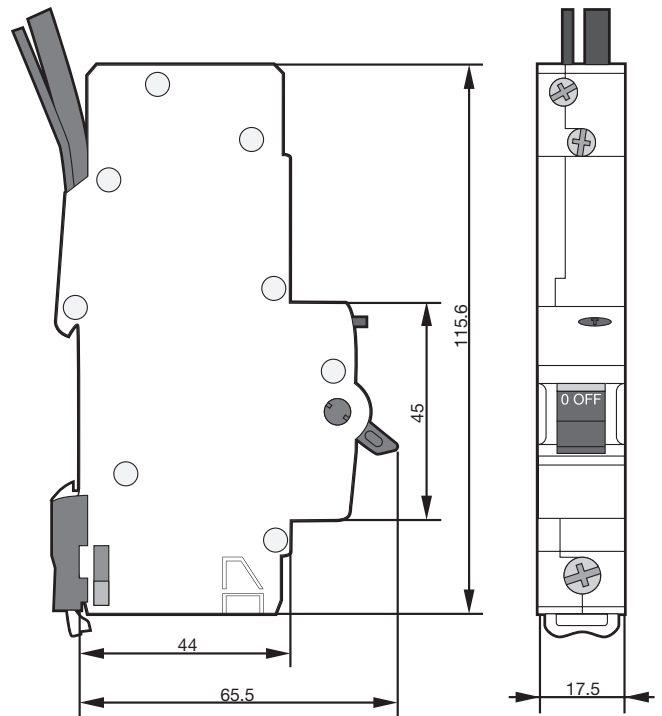

References

Catalogue reference	Residual current I _{rn}	Current rating (A)	Width in 17.5mm
ACA106T	10mA	6	1
ACA110T	10mA	10	1
ACA116T	10mA	16	1
ACA120T	10mA	20	1
ACA125T	10mA	25	1
ACA132T	10mA	32	1