

Beschreibung:

Anschlussklemmen

- a|a|b** i2-BUS Anschluss (Beide 'a' Anschlüsse intern verbunden)
- R** Anschluss des Etagenruftasters (Gegenpol i2-BUS 'a' oder 'b')

Drehcodierschalter zur Adresseinstellung

- schwarz: Gruppenadresse 0-F (entsprechend der Einstellung am Tastenexpander BTE-116)
- blau: Teilnehmeradresse 0-F (entsprechend des verwendeten Anschlusses 0-F am Tastenexpander)

Es dürfen max. 3 Haustelefone mit der gleichen Adresse installiert werden (Parallelbetrieb)!

Jumper Konfiguration

Jumper	Funktion
JP1 gesteckt	Tasten ☼ + Ⓞ ⇒ Licht- und Türöffnerfunktion (Werkseinstellung)
JP1 gezogen	☼ Taste Internruf zu Adresse F/F Ⓞ ⇒ Taste Internruf zu Adresse F/E
JP2 gesteckt	Keine Weiterleitung des Etagenrufs (Werkseinstellung)
JP2 gezogen	Weiterleitung des Etagenrufs zum parallel adressierten Haustelefon

Ruftonlautstärke einstellen


Drücken Sie bei aufgelegtem Hörer die Taste **P** und halten diese gedrückt. Mit der ☼ Taste lässt sich die Rufonlautstärke in 3 Stufen einstellen.

Rufon einstellen

Es stehen 12 harmonische Ruföne (davon 6 Gongtöne) zur Verfügung, die jeweils verschiedenen Türstationen, dem Etagenruf oder dem Internruf zugeordnet werden können. Eingestellt wird immer jener Rufon, welcher zuletzt ausgelöst wurde.


Drücken Sie bei aufgelegtem Hörer die Taste **P** und halten diese gedrückt. Mit der Taste ⏏ lässt sich der gewünschte Rufon auswählen.

Montage:

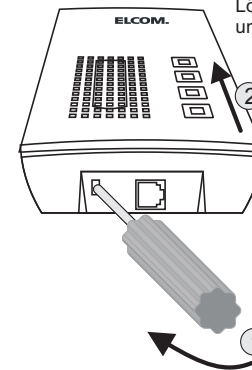


Lösen Sie mit einem Schraubendreher die Verriegelung und schieben Sie den Gehäusedeckel nach oben.

Ziehen Sie das Verbindungskabel im Gehäuseunterteil ab.

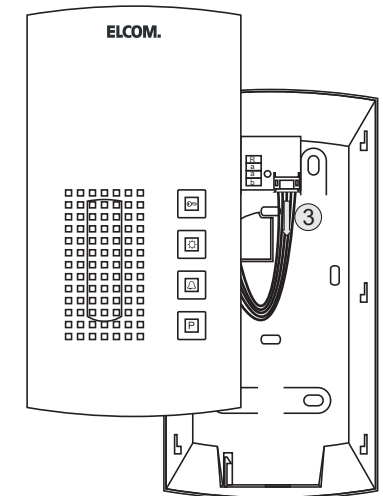


Montieren Sie den Gehäuseboden und schließen Sie die Zuleitung an.

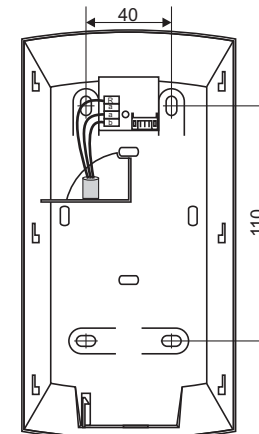

Draht anschließen:
Draht einfach einstecken.
(Massivleiter Ø 0,4-0,8mm)



Draht lösen:
Orangenen Drücker betätigen.
Draht herausziehen.

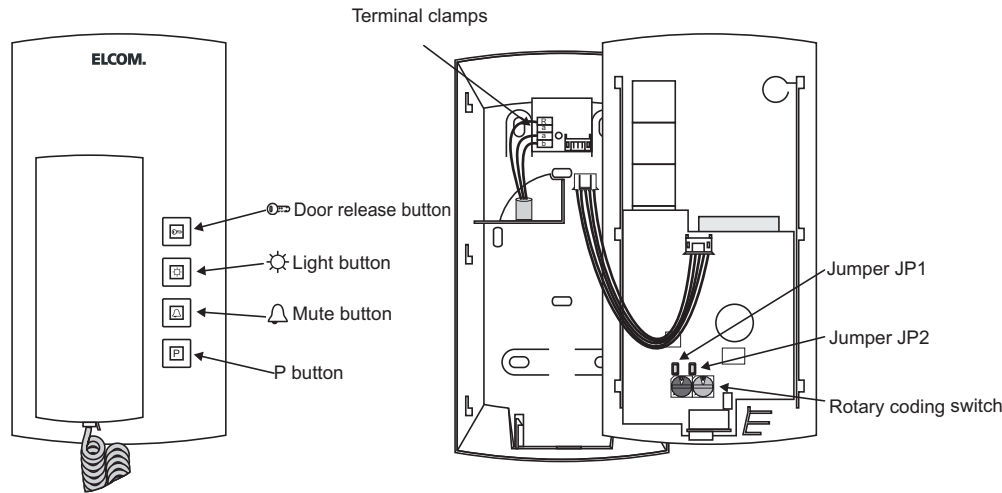

Description:

Terminal clamps

- [a|b] i2-BUS Terminals (both "a" connections connected internally)
- [R] Terminal to the storey call button (opposite pole to i2-BUS "a" or "b")

Rotary coding switch for adress configuration

- Black: Group addresses 0-F (Setting of the corresponding BTE-116)
- Blue: Intercom address 0-F (Terminal of the corresponding doorbell button on BTE-116)

A maximum of 3 intercoms with the same adress can be installed (parallel operation)!

Jumper	Function
JP1	Pushed In Buttons ⚡ + ⓪ light and door release function (Factory setting)
	Pulled Out ⚡ Button internal call to adress F/F ⓪ button internal call to adress F/E
JP2	Pushed In No forwarding of storey calls (Factory setting)
	Pulled Out Forwarding of storey calls to parallel adressed intercoms


Set the ring tone volume

Lift the handset and press and hold the **P** button.
3 ring tone volumes can be selected with the ⚡ button.


Set the ring tone

12 harmonic ring tones (6 of these are gong tones) are available which can be assigned to the different door stations, the floor call or the internal call. The ring tone last used will always be preset.
Lift the handset and press and hold the **P** button.
The desired ring tone can be selected with the 🔔 button.


Installation:

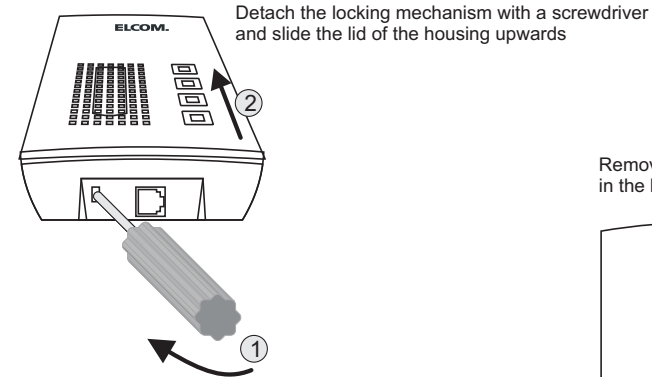

Remove the connection cable in the lower part of the housing.

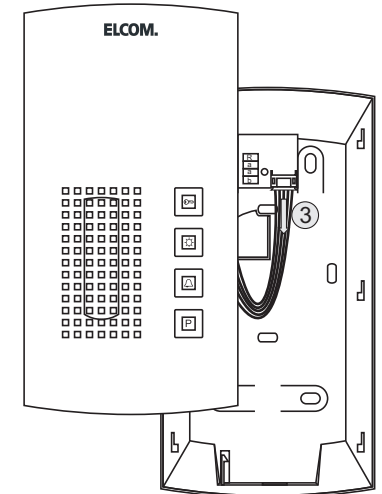

Mount the base of the housing and connect up the supply line.

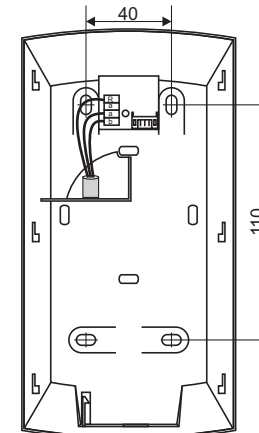

Connecting the conductor: Simply plug in the conductor.
(Solid conductor diameter 0.4-0.8mm)

Detaching the wire: Actuate the orange trigger. Pull the wire out.

