

Safety switches - RCCB's

Catalogue numbers:
CDAxxxT, CDxxxT, CExxxT

Specifications:

Regulatory

- Approval AS/NZS 61008.1



Electrical

- Voltage rating - 230V AC (2P) ; 230/400V AC (4P)
- 2 modules: 30mA - 25A to 100A
100mA - 25A to 100A
- 4 modules: 30mA - 25A to 100A
100mA - 80A, 100A


Mechanical

- Number of operations - 4000
- Connection capacity:
Rigid - 25mm² (50mm² for 80A, 100A)
Flexible - 16mm² (35mm² for 80A, 100A)
- Positive contact indication windows
- Bi-connect allowing 2 terminal connection points and Neutral Bypass for the busbar
- Earth fault indication window
- Tightening torque 2.8Nm

Accessories

- Toggle locking kit -
- Auxiliary switch -
- Alarm switch -
- AC shunt trip -
- AC undervoltage -
- Combination auxiliary & alarm -

MZN175
MZ201
MZ202
MZ203
MZ206
CZ001

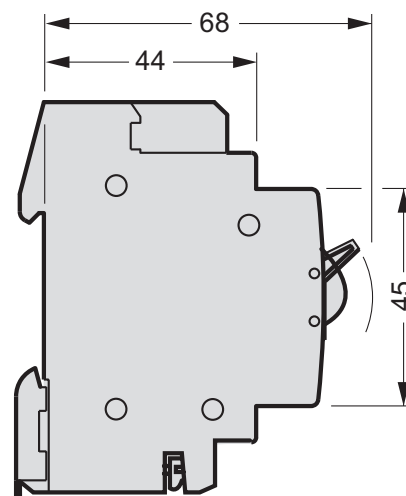

References

Cat. ref.	Type	Residual current I _{rn}	Current rating (A)	Width in 17.5mm	Cat. ref.	Type	Residual current I _{rn}	Current rating (A)	Width in 17.5mm
CDA225T	A	30mA	25	2	CE225T	AC	100mA	25	2
CDA240T	A	30mA	40	2	CE240T	AC	100mA	40	2
CDA263T	A	30mA	63	2	CE263T	AC	100mA	63	2
CD280T	AC	30mA	80	2	CE281T	A	100mA	80	2
CD284T	AC	30mA	100	2	CE285T	A	100mA	100	2
CDA425T	A	30mA	25	4	CE481T	A	100mA	80	4
CDA440T	A	30mA	40	4	CE485T	A	100mA	100	4
CDA463T	A	30mA	63	4					
CD481T	A	30mA	80	4					
CD485T	A	30mA	100	4					