

## Technical Characteristics

### Electrical Characteristics

Voltage Supply	230V ±10% 50/60Hz
Consumption	1VA
Output	1 Changeover contact 16A - 250V AC 1 3A - 250V cosφ = 0.6 1000W Incandescent lighting

### Functional Characteristics

Number of programs	5 Adjustable Pre-recorded Programs
Accuracy	±6min per year
Supply Failure Reserve	Total of 3 years

### Environment

Working Temperature	-10°C to +50°C
Storage Temperature	-10°C to +60°C


 
 
### Cable Capacity

Cable Capacity	1 to 4mm <sup>2</sup>
----------------	-----------------------


### Main Characteristics

Easy to program: 5 programs are pre-recorded. The user just has to select the program which corresponds to its use and modify time switches if necessary.

The 5 pre-registered programs are as follows

P	Prog
P0	OFF
P1	ON
P2	
P3	
P4	

## Product Presentation

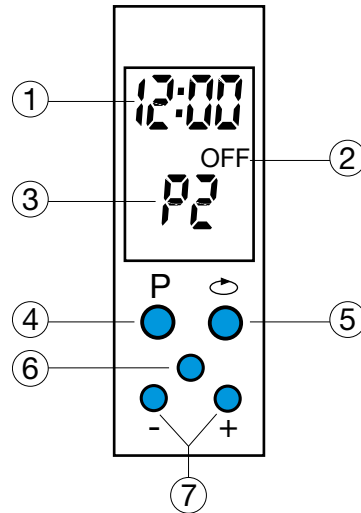

### Display

1. Time
2. Circuit Status
3. Program Selection

### Buttons

4. P to select the program to apply
5. Reset
6. ↻ to scroll program steps
7. + and - : to input time

## Electrical Connection

