


MCB 6kA, C curve

Catalogue numbers:
MSN1xx, MSN2xx, MSN3xx

Specifications:

Regulatory

- Approval AS/NZS 60898
- 

Electrical


- Thermal trip characteristic - C curve (5 - 10xIn)
- Breaking capacity - 6000A
- Voltage rating - 240/415V AC
- Current rating - 6 - 63A

Mechanical

- Number of operations - 20,000
- Connection capacity:
 Rigid conductor - 25mm² max.
 Flexible conductor - 16mm² max.
- Bi-connect allowing two connection points

Accessories

- Toggle locking kit - **MZN175**
- Heat dissipation insert - **LZ060**

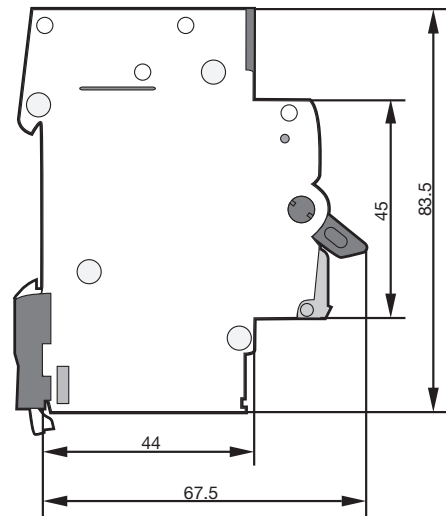

References Note: 'R' on the end of the Cat. ref. denotes red coloured toggle

Cat. ref.	In (A)	Width in 17.5mm	Cat. ref.	In (A)	Width in 17.5mm	Cat. ref.	In (A)	Width in 17.5mm
MSN106	6	1	MSN206	6	2	MSN306	6	3
MSN110	10	1	MSN210	10	2	MSN310	10	3
MSN113	13	1	MSN216	16	2	MSN316	16	3
MSN116	16	1	MSN220	20	2	MSN320	20	3
MSN120	20	1	MSN225	25	2	MSN325	25	3
MSN125	25	1	MSN232	32	2	MSN332	32	3
MSN132	32	1	MSN240	40	2	MSN340	40	3
MSN140	40	1	MSN250	50	2	MSN350	50	3
MSN150	50	1	MSN263	63	2	MSN363	63	3
MSN163	63	1	MSN263R	63	2	MSN363R	63	3
MSN163R	63	1						