

MCB's 10kA, D curve

Catalogue numbers:

NDN1xxC, NDN2xxC, NDN3xxC, NDN4xxC

Specifications:

Regulatory


- Complies with AS/NZS 60898

Electrical

- Thermal trip characteristic - D curve (10-20xIn)
- Breaking capacity - 10,000A
- Voltage rating - 240/415V AC
- Current rating - 6 - 63A

Mechanical

- Number of operations - 20,000
- Connection capacity:
 - Rigid conductor - 35mm² max.
 - Flexible conductor - 25mm² max.

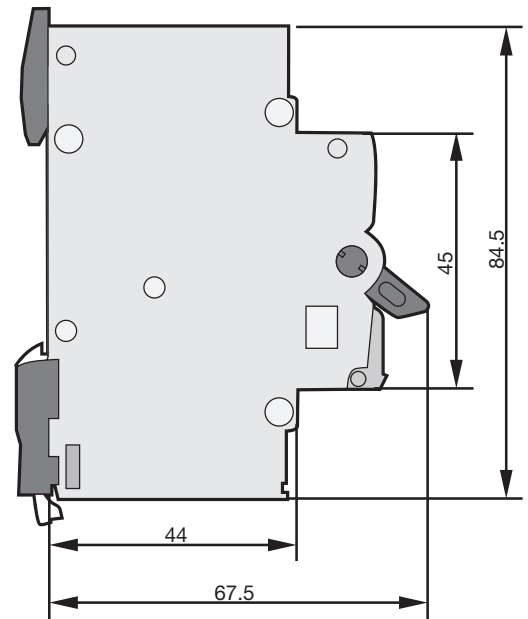

Accessories

- Heat Dissipation Inserts - LZ060
- Auxiliary Contact - MZ201
- Undervoltage release - MZ206
- Terminal Cover - MZN120
- Locking Device - MZN175
- Signal and Auxiliary contact - MZ202
- Phase Barrier - MZN121

References

Cat. ref.	In (A)	Width in 17.5mm	Cat. ref.	In (A)	Width in 17.5mm	Cat. ref.	In (A)	Width in 17.5mm	Cat. ref.	In (A)	Width in 17.5mm
NDN106A	6	1	NDN206A	6	2	NDN306A	6	3	NDN406A	6	4
NDN110A	10	1	NDN210A	10	2	NDN310A	10	3	NDN410A	10	4
NDN116A	16	1	NDN216A	16	2	NDN316A	16	3	NDN416A	16	4
NDN120A	20	1	NDN220A	20	2	NDN320A	20	3	NDN420A	20	4
NDN125A	25	1	NDN225A	25	2	NDN325A	25	3	NDN425A	25	4
NDN132A	32	1	NDN232A	32	2	NDN332A	32	3	NDN432A	32	4
NDN140A	40	1	NDN240A	40	2	NDN340A	40	3	NDN440A	40	4
NDN150A	50	1	NDN250A	50	2	NDN350A	50	3	NDN450A	50	4
NDN163A	63	1	NDN263A	63	2	NDN363A	63	3	NDN463A	63	4