
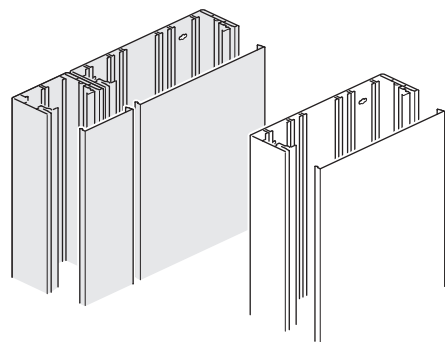
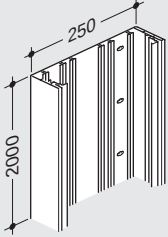
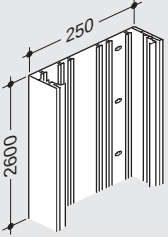
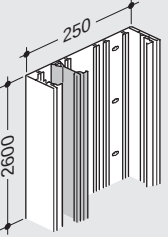
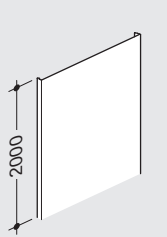
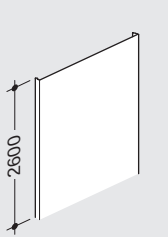
 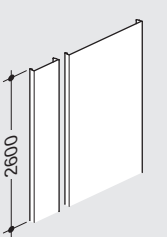


- (F) (B) Goulotte d'installation
- (GB) Trunking
- (D) Kabelkanal
- (I) Canalina
- (E) Canal
- (P) Calha
- (S) Kabelkanal
- (NL) (B) Installatiekanalen







Notice d'instructions
 User instructions
 Bedienungsanleitung
 Istruzioni d'impiego
 Instrucciones de uso
 Instruções
 Bruksanvisning
 Gebruiksaanwijzing




Gamma 13, Vega : JA 100N + JC 100N / JA 200N + JC 200N / JA 250N / JA 260N

								
JA 100N			x 2					2 x 4
JC 100N					x 4			
JA 200N				x 2				2 x 4
JC 200N						x 4		
JA 250N		x 3			x 3			3 x 4
JA 260N			x 2			x 2		2 x 4


Gamma 18 : JA 105N + JC 105N + JA 100N + JC 100N / JA 105N + JC 105N + JA 200N + JC 200N

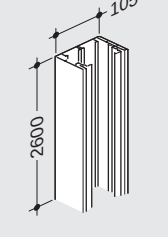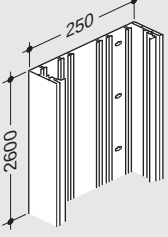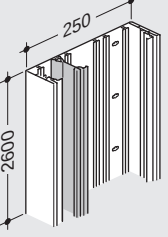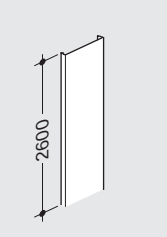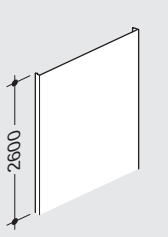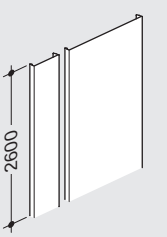								
JA 105N		x 2						
JC 105N					x 4			
JA 100N			x 2					2 x 4
JC 100N						x 4		
JA 200N				x 2				2 x 4
JC 200N							x 4	


Gamma 13

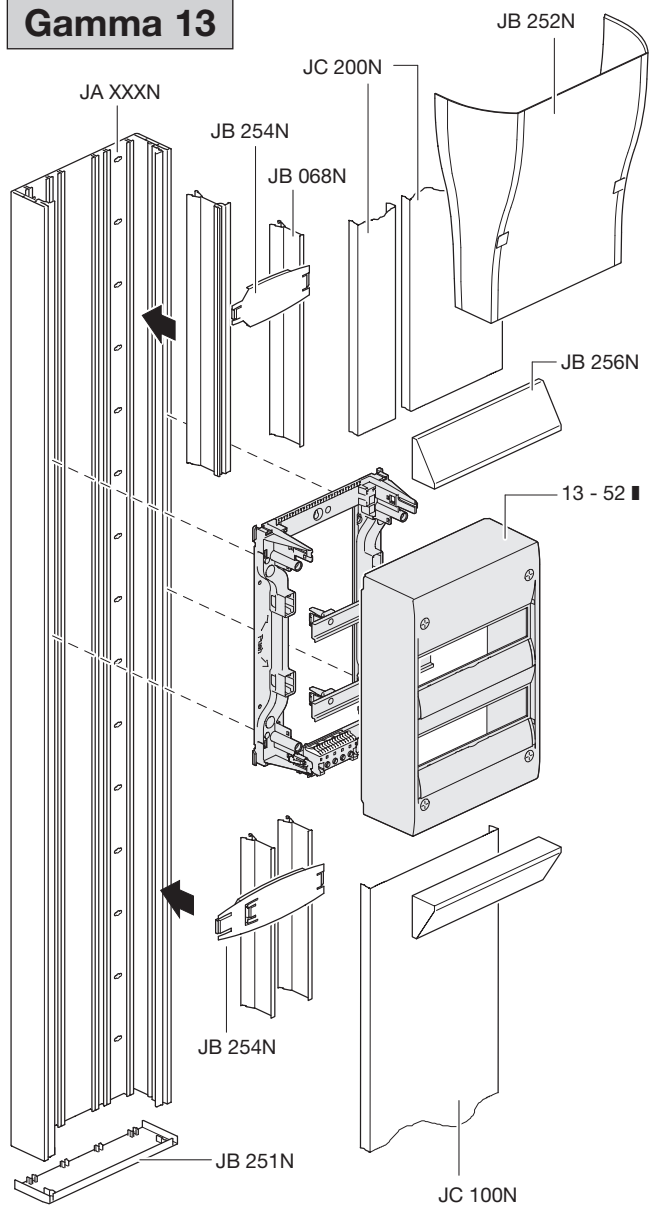


Gamma 18

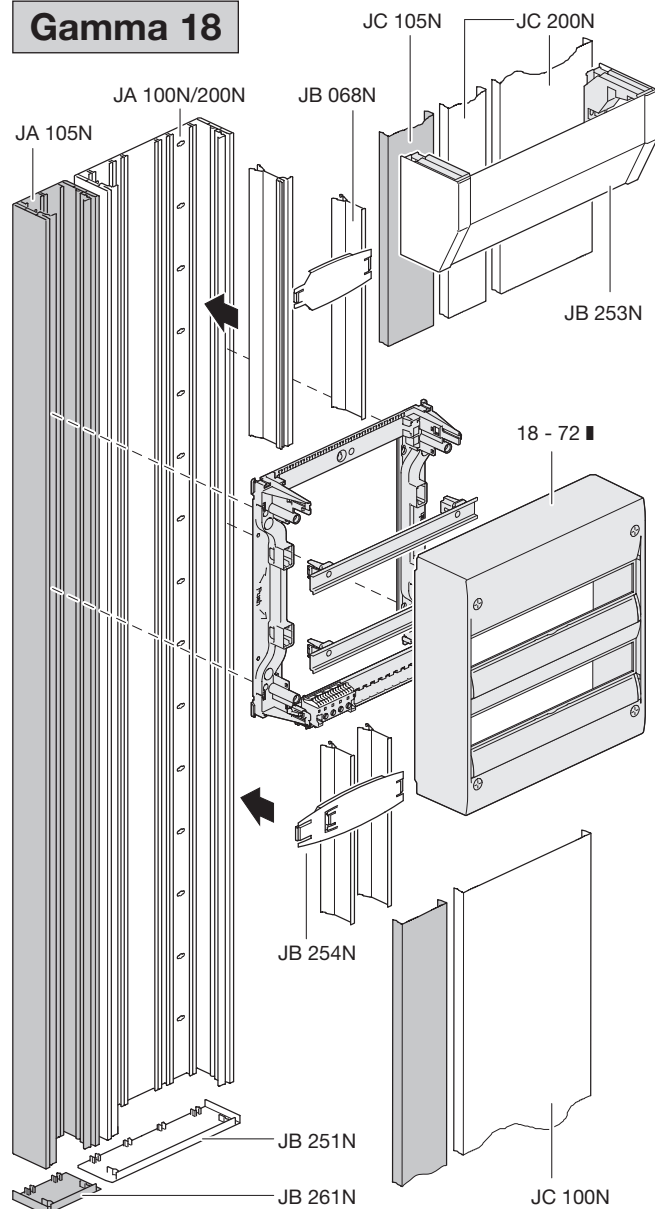

Vega

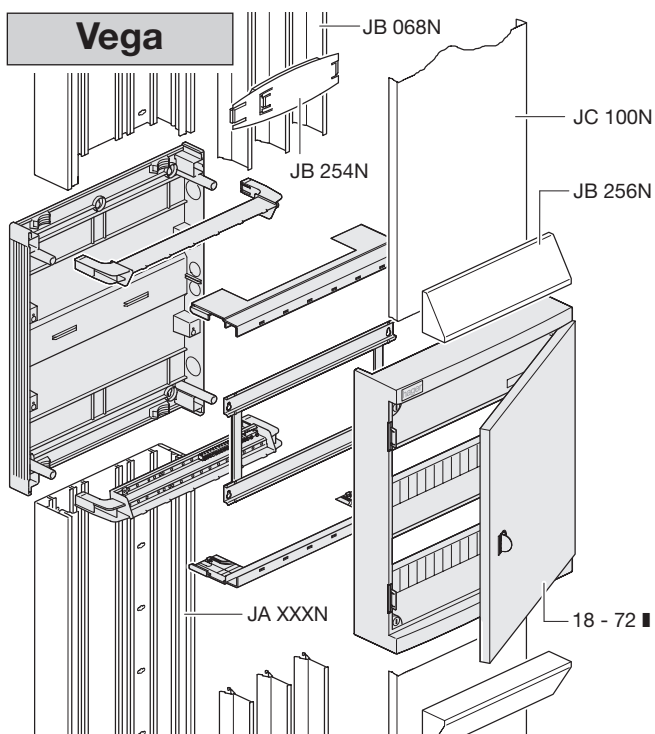

JB 254N + JA 100N/250N/260N

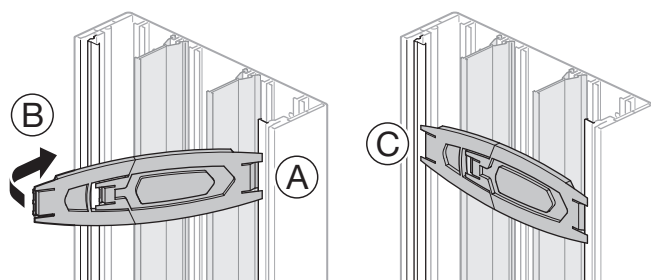

JB 254N + JA 200N

