

Vector enclosures

Catalogue numbers:
VExxxH - Transparent door
VExxxHP - Opaque door

Specifications:

Regulatory

- IEC 60439-3 CE certified
- IEC 60695-2-10 and 60695-2-11: 850°C
- Compliant to REACH & RoHS recommendations

Electrical

- Class II 

Mechanical

- IP65
- -25°C to 100°C
- UV resistant: UL746C
- Impact test: < 12 pole IK07
 ≥ 12 pole IK08

Material


- Polycarbonate
- Excellent chemical resistance
- Excellent UV resistance
- Colour: RAL7035

Other

- M20 - M40 knockouts supplied.
 Size & quantity depend on enclosure size.


Accessories

- | | | |
|------------------------------------|-------|----------|
| - Key lock | | VZ311 |
| - Wall fixing brackets | | VZ011 |
| - DIN mount pole fillers (10 pack) | | PFGPF10P |
| - Standard pole fillers (5 pack) | JP010 | |
| - IP66 vented cable glands | 20mm | VZ020D |
| | 25mm | VZ025D |
| | 32mm | VZ032D |

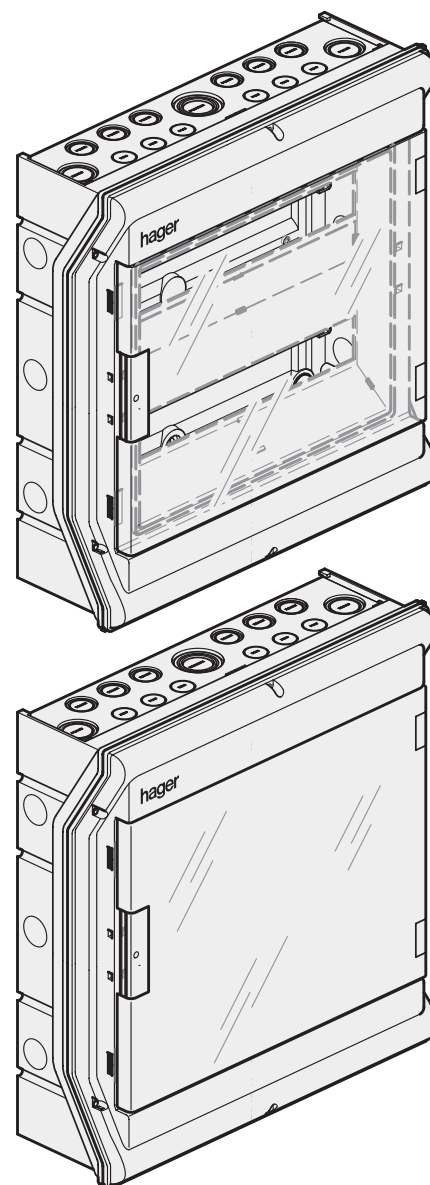


Enclosure sizes


References		Row	A	B
VE106	6I	1	165	190
VE110	10I	1	237	210
VE112	12I	1	310	302
VE118	18I	1	418	302
VE212	24I	2	310	427
VE218	36I	2	418	452
VE312	36I	3	310	552
VE318	54I	3	418	602
VE412	48I	4	310	677

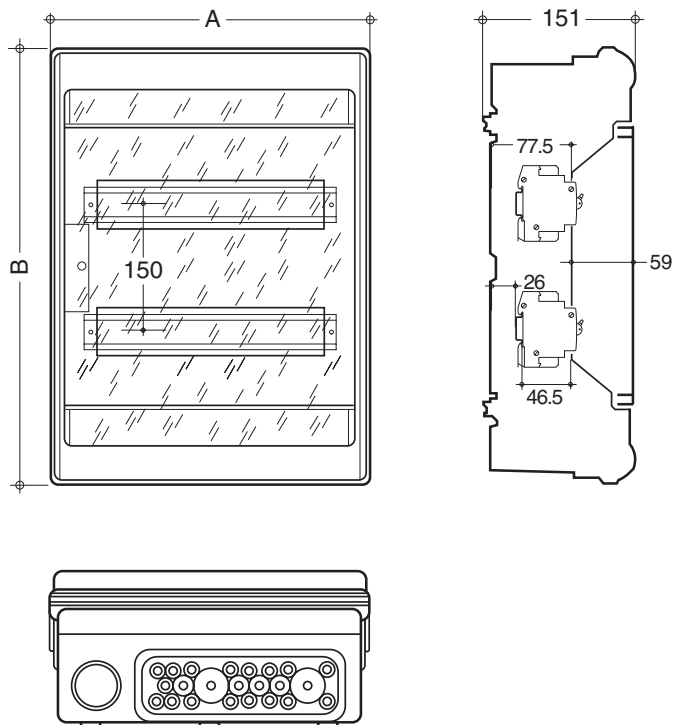

Mounting holes

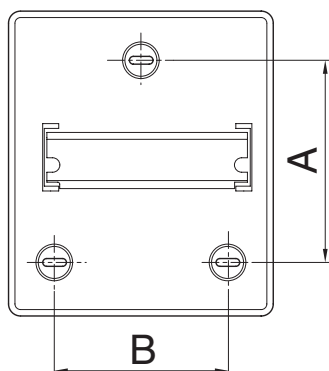

	VE103	VE106	VE110
A (mm)	120	126	136
B (mm)		108	180

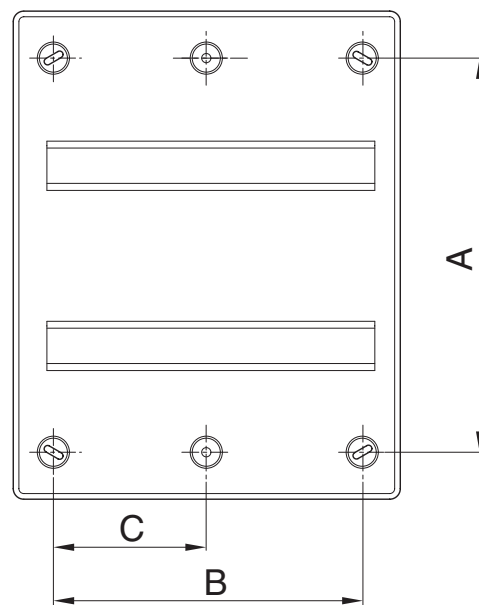

	VE112	VE212	VE312	VE412	VE118	VE218	VE318
A (mm)	155	280	405	530	155	305	455
B (mm)	230	230	230	230	338	338	338
C (mm)	115	115	115	115	169	169	169