

LED Dimmer

Catalogue number:
WBMD400LED

Specifications:

Electrical

- Voltage: 240V ac +5% / -10%, 50Hz
- Load MAX LED 120W
- Load MIN LED 10W
- Load Qty MAX 10 LED lights

Mechanical

- External material UV stabilised polycarbonate
- Terminals accommodate 4 x 1.5mm cable


Packaging

- Box qty 5
- Carton qty 160


Note:

LED loads should be tested with this dimmer prior to installation.


Some LED loads may not be compatible due to the type of LED driver within the LED light.

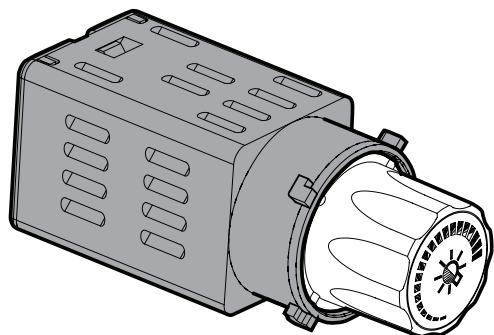

Dimmer Connections
Two Way

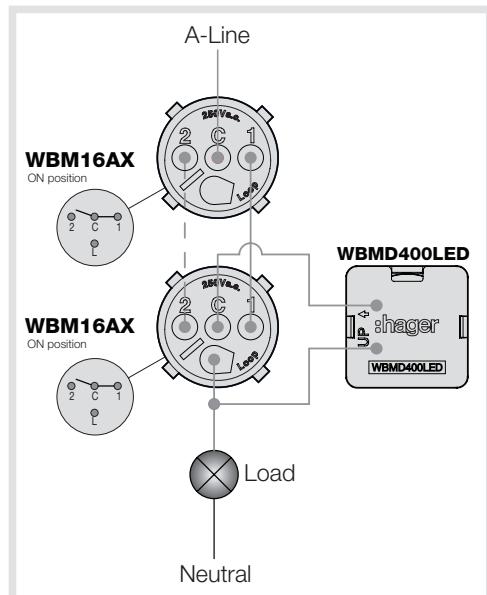

Dimmer Connections

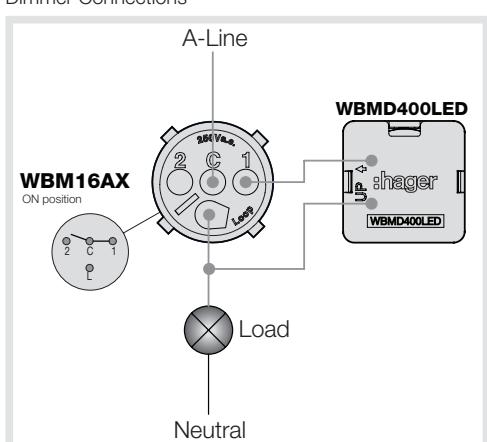

Feature	Benefit
Rotoloc compatible	Mechanism will not pushback through plate into wall cavity
Assembled into rear of plate	Dimmer knob cannot be removed
Soft start	Adds life to the bulb
Overheating protection	Prevents accidental damage to dimmer
Short circuit protection	Protects life of dimmer by automatically cutting off load
UV stabilised, PC material	Does not fade, high impact strength
Amber base moulding	Easy recognition of mechanism type