

All product(s) must be installed by a suitably competent electrician giving consideration to their intended use and in accordance with the current edition of BS 7671 (IET Wiring Regulations).

The Electricity at Work regulations and the Health and Safety at Work Act shall be complied with.

Only equipment and arrangements specified in Hager's technical documentation / catalogue shall be used

Install in the vertical plane only.

Notice:

To prevent potential overheating from loose connections the installer shall check connections are tightened to the torque levels stated in these instructions prior to energising this board. This check should include factory made connections which may have loosened in transit.

Interface Characteristics

Rated & operational voltage (U_n/U_e)	415V a.c. 50Hz
Rated insulation voltage (U_i)	690V a.c. 50Hz
Rated impulse withstand voltage (U_{imp})	6kV

Rated Current of the assembly (I_{nA}) and a circuit (I_{nc})

JG36BM	160A
JG37BM	160A
JG37BR	160A
JG38BR	200A
JG40BM	250A
JG41BM	250A
JG42BS	250A
JG43BS	250A

Rated conditional short-circuit current of the assembly

25kA

Rated peak withstand current (I_{pk})

52.5kA

Rated diversity factor (RDF) / values of assumed loading

RDF = 1

Rated frequency (f_n)

50Hz

Enclosed MCCB Assembly

BS EN 61439-2

MCCB only

BS EN 60947-2

Degree of protection

IP3X with cover fitted

Intended location

Indoor use only

Mechanical impact protection

IK05

Type of construction

Fixed parts

Intended use

Skilled persons only

Electromagnetic compatibility

Environment B

Stationary assembly external design

Wall mounted

Pollution degree

3

Form of separation


Form 2a

Connections of functional unit:-
Incoming/Outgoing circuit connection

F (Fixed)

Suitable earthing system (When installed in an electrical system conforming to BS 7671)

TNC-S. TN-S & TT

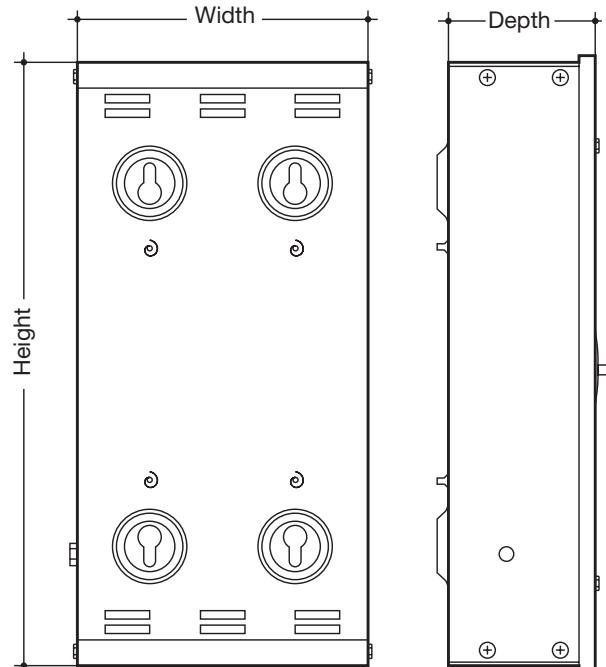

	Height A	Depth B	Width C	Weight (kg)
JG36BM	660	120	260	10.5
JG37BM	660	120	260	10.5
JG37BR	765	120	260	11.5
JG38BR	765	120	260	11.5
JG40BM	660	120	260	10.5
JG41BM	660	120	260	10.5
JG42BS	660	120	260	10.5
JG43BS	660	120	260	10.5

Warranty

This distribution board is offered with a 24 month warranty against defective material or manufacture. If a warranty claim is necessary, please call the technical support number given at the bottom of the page and we will be pleased to help.

Hager Ltd.
Hortonwood 50
Telford
Shropshire
TF1 7FT

Sale Service Centre: 01952 675612
Technical Service Centre: 01952 675689