
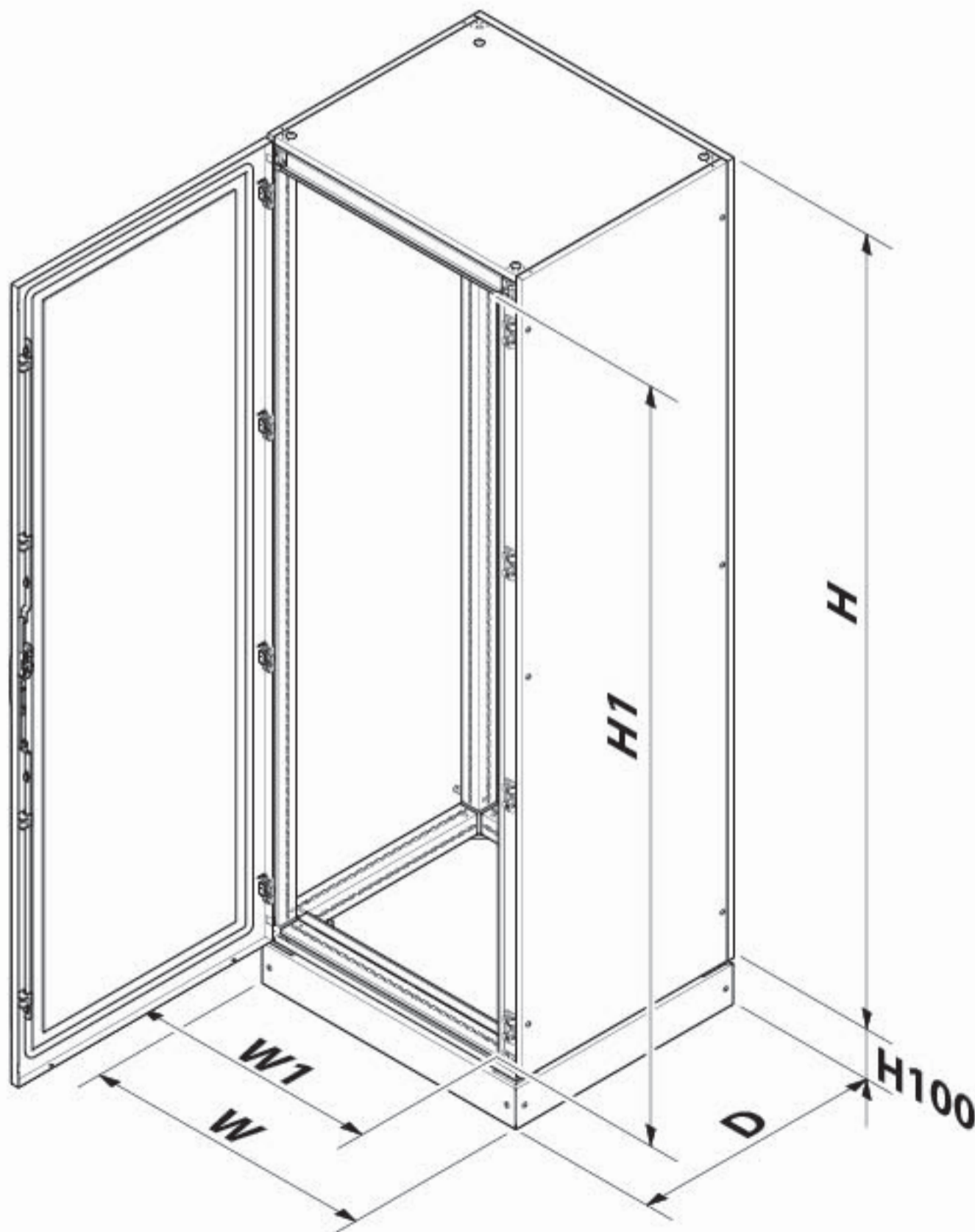



- ⓁⒹ Montageanleitung
- ⓁⒻ Notice d'instructions
- ⓁⒼ Mounting instructions
- ⓁⒽ Montage instructie
- ⓁⒿ Monteringsvejledning
- ⓁⓂ Asennusohje
- ⓁⓃ Montasjeanvisning
- ⓁⓈ Monteringsinstruktioner
- ⓁⓉ Istruzioni di montaggio
- ⓁⓊ Instrucciones de montaje
- ⓁⓇ Instruções de montagem
- ⓁⓀ Montážní návod
- ⓁⓁ Uputstvo za montažu

- ⓁⓇ Upute za montažu
- ⓁⓂ Szerelési útmutató
- ⓁⒽ Montavimo instrukcija
- ⓁⒻ Mont žas instrukcija
- ⓁⒼ Instrukcja montażowa
- ⓁⓇ Instrucțiuni de montare
- ⓁⓀ Návod na montáž
- ⓁⓃ Инструкция по монтажу
- ⓁⓈ Инструкции за монтаж
- ⓁⒼ Οδηγίες χώνευσης
- ⓁⓉ Navodilo za montažo
- ⓁⓂ Paigaldusjuhised
- ⓁⓇ Leiðbeiningar





quadro evo
enclosure segregations

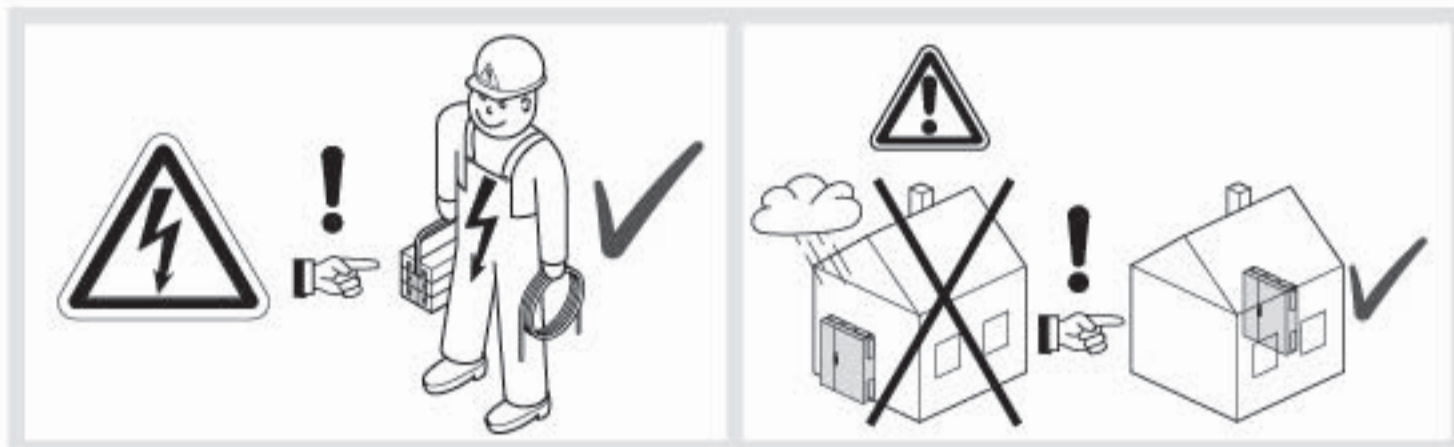


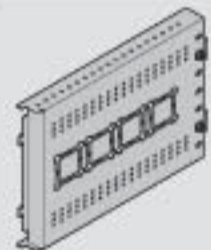
W	W1	H	H1	D
450	350			400
700	600	1900	1800	600
900	800	2100	2000	800
1000	600			800




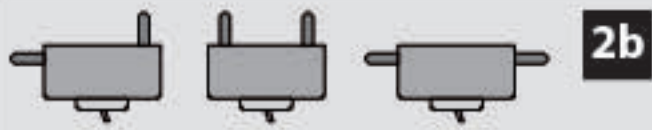


2b

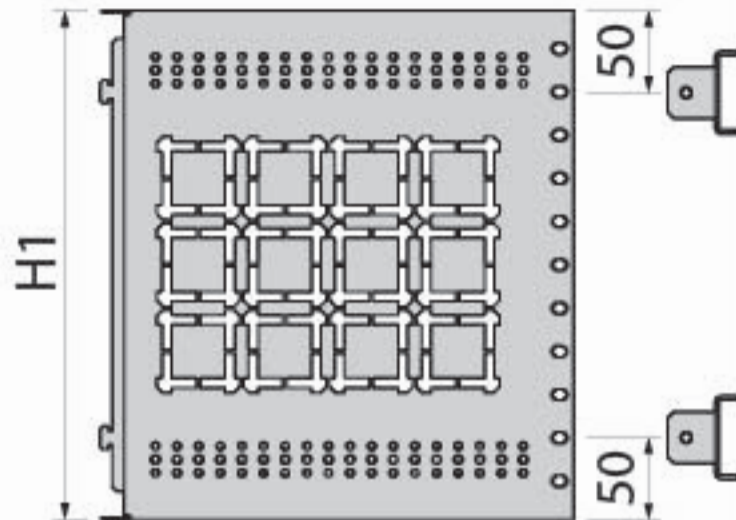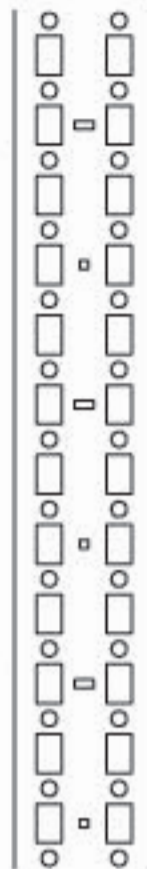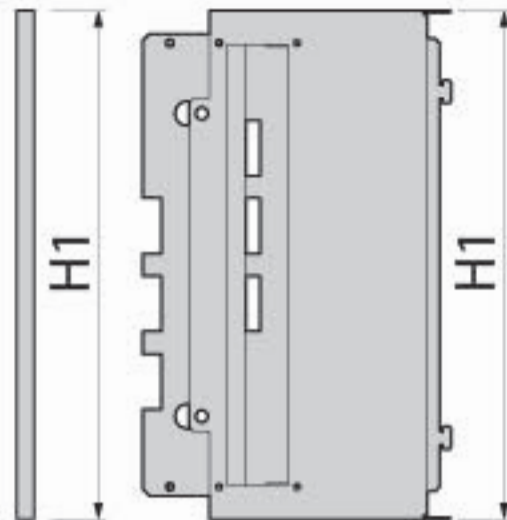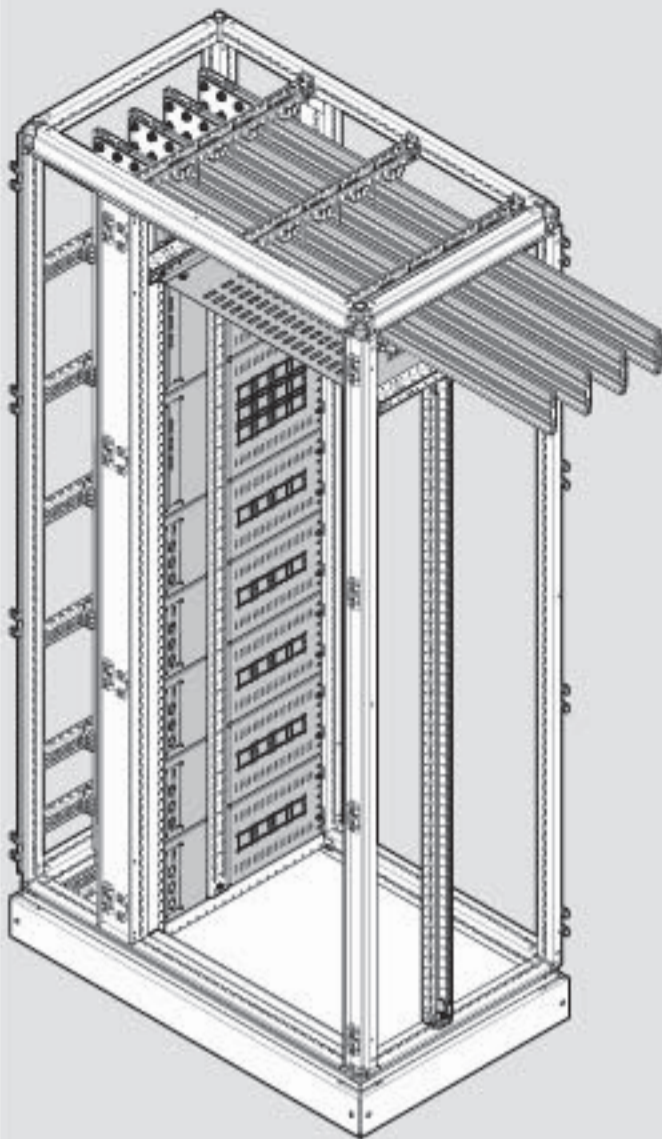


	W	H1	D
UC150FL	///	150	///
UC200FL	///	200	///
UC300FL	///	300	///
UC400FL	///	400	///
UC600FL	///	600	///




	W	H1	D
UC1540BL	///	150	400
UC1560BL	///	150	600
UC1580BL	///	150	800
UC2040BL	///	200	400
UC2060BL	///	200	600
UC2080BL	///	200	800
UC3040BL	///	300	400
UC3060BL	///	300	600
UC3080BL	///	300	800
UC4040BL	///	400	400
UC4060BL	///	400	600
UC4080BL	///	400	800
UC6040BL	///	600	400
UC6060BL	///	600	600
UC6080BL	///	600	800

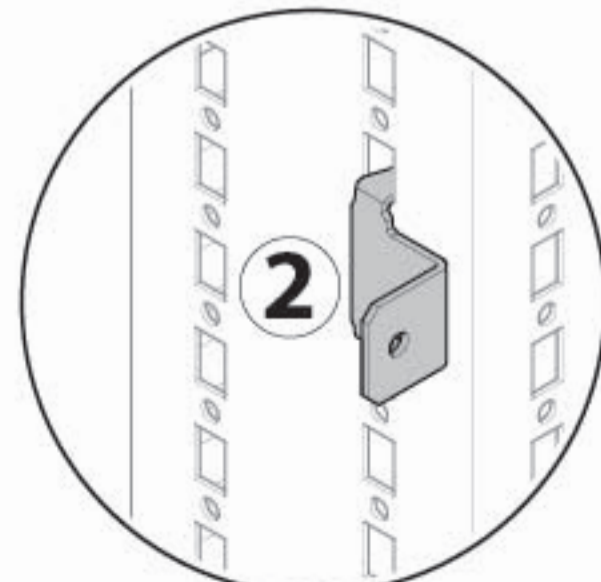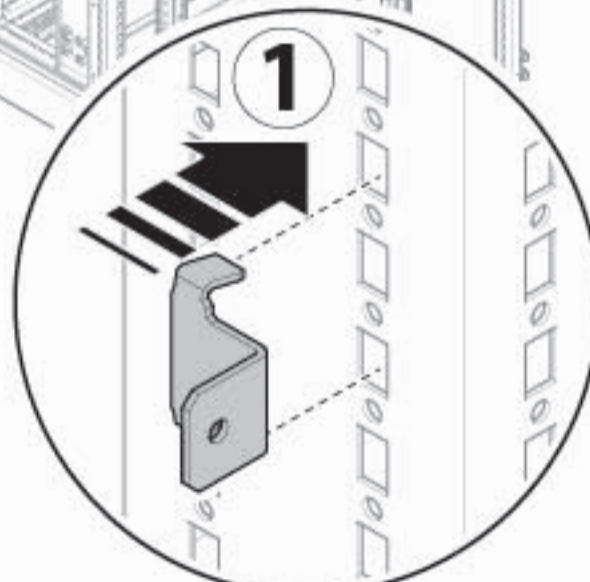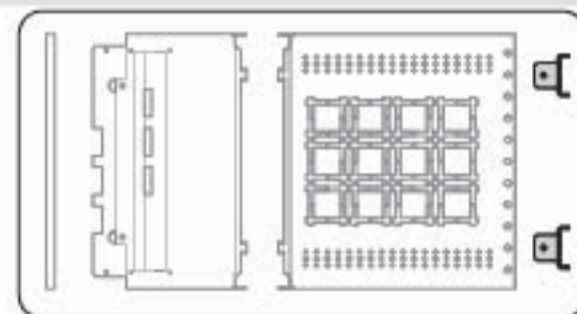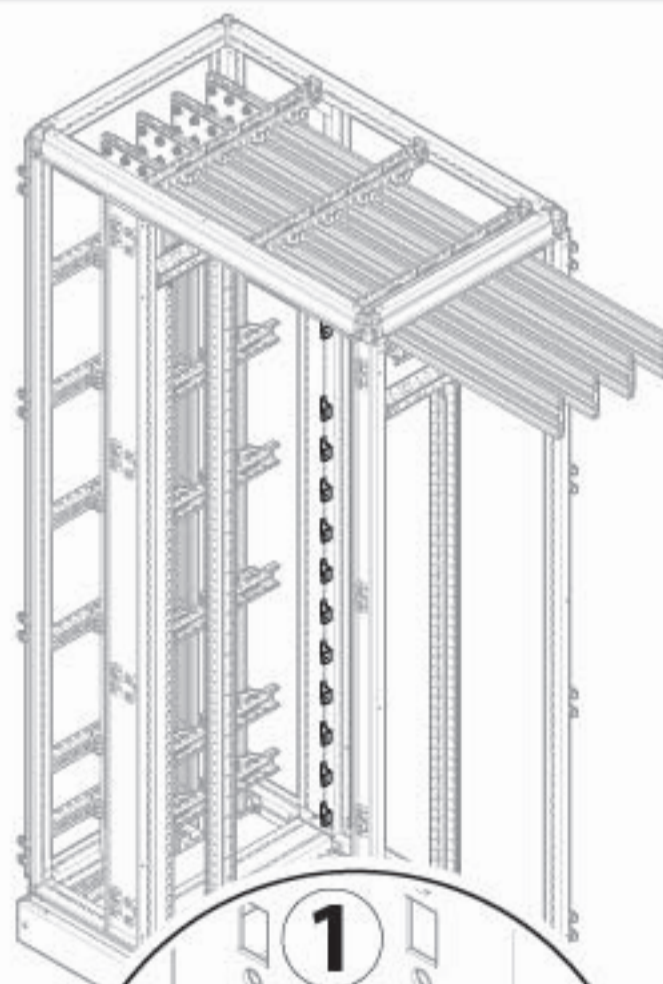


UCxxxxBL



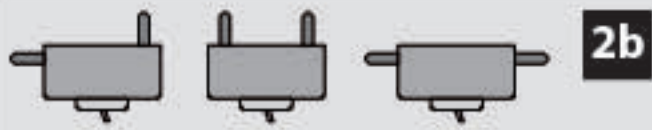



2b



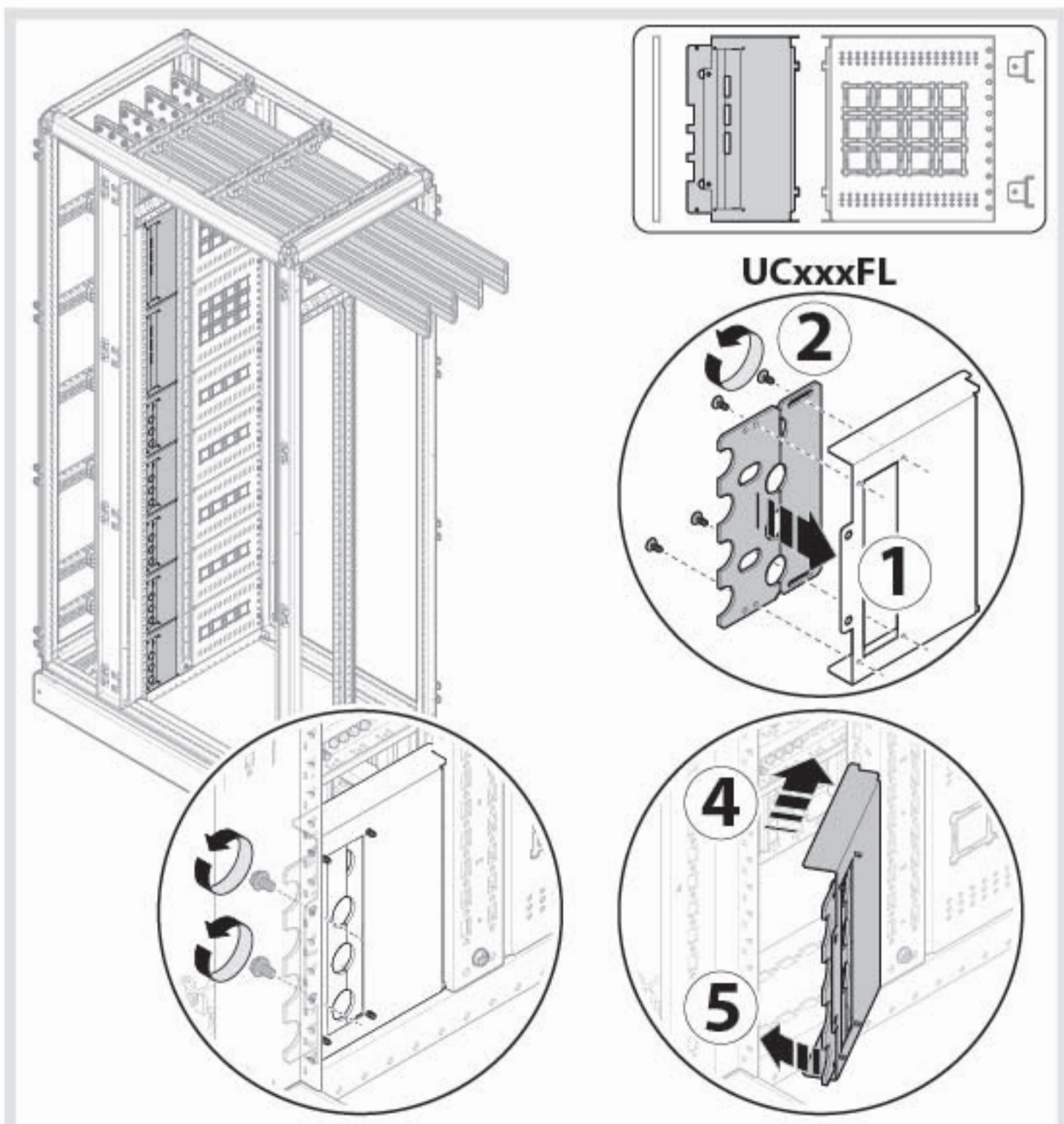
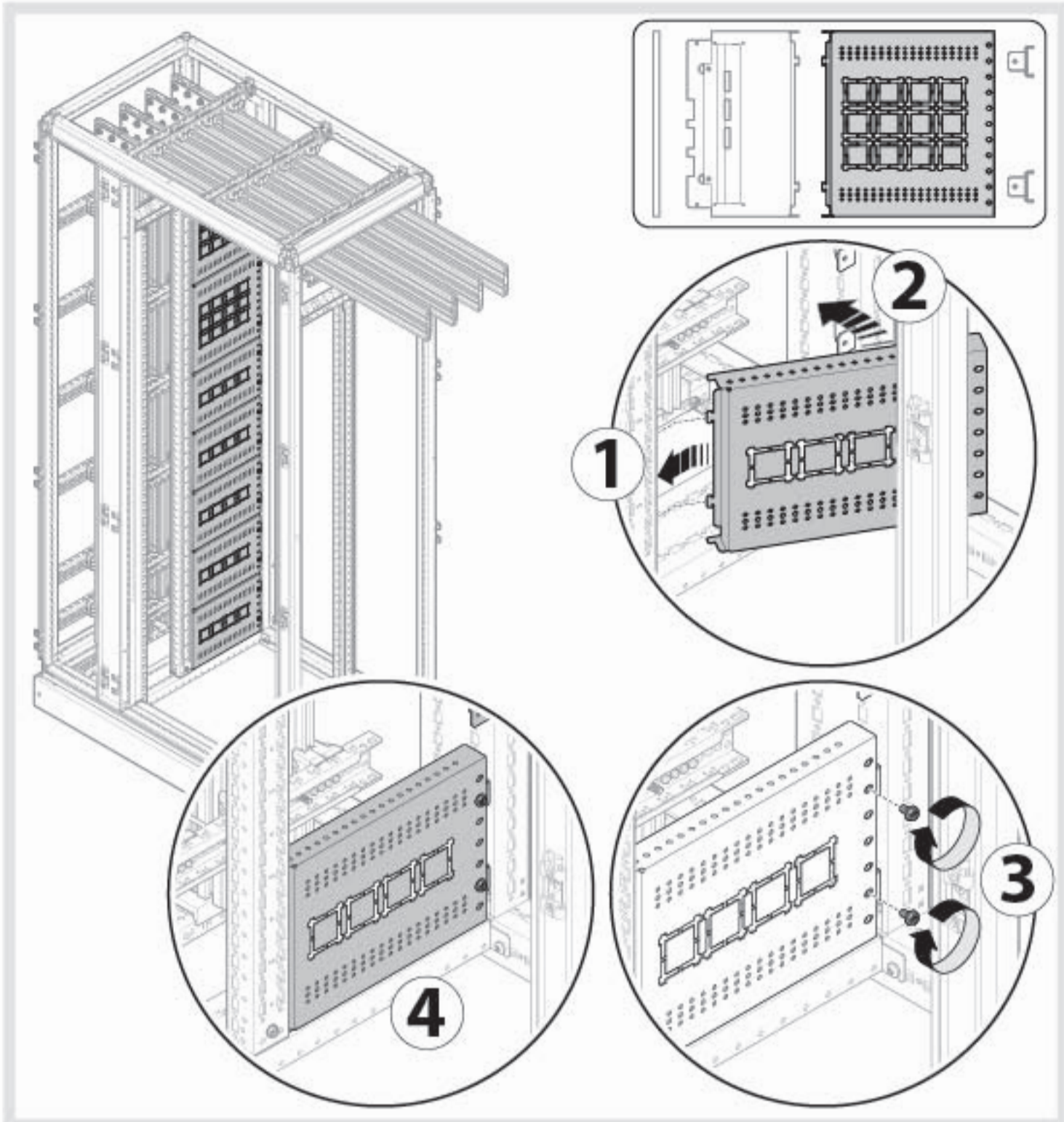
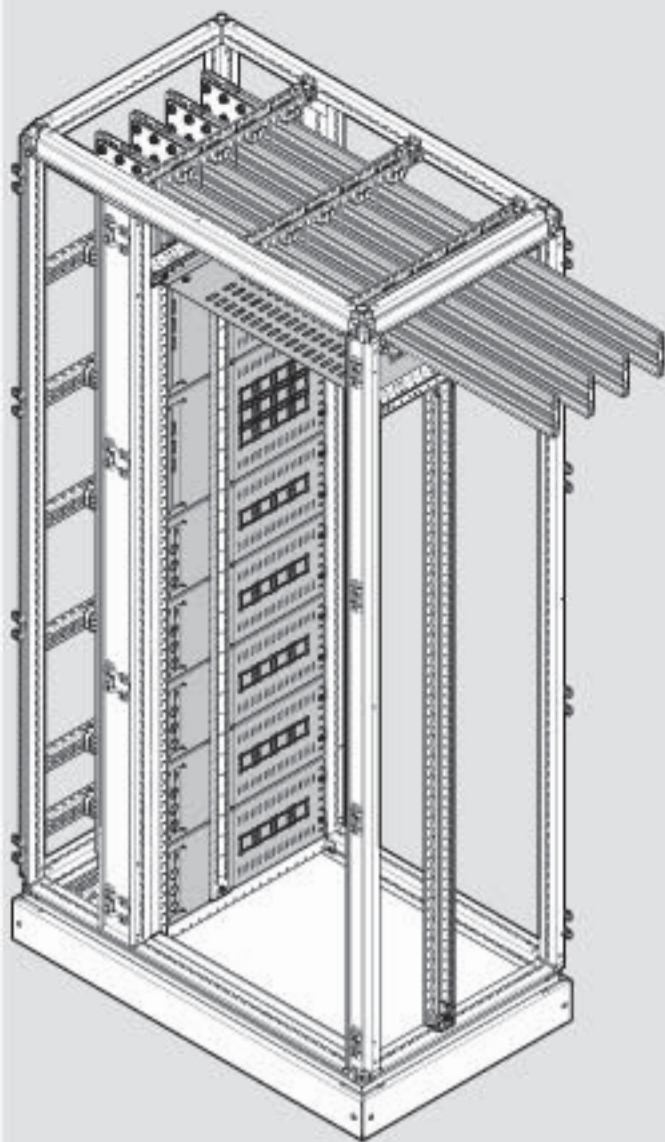


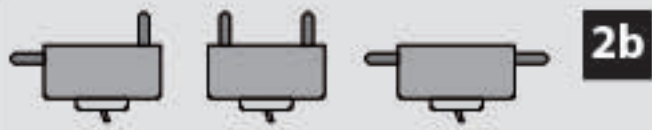


2b

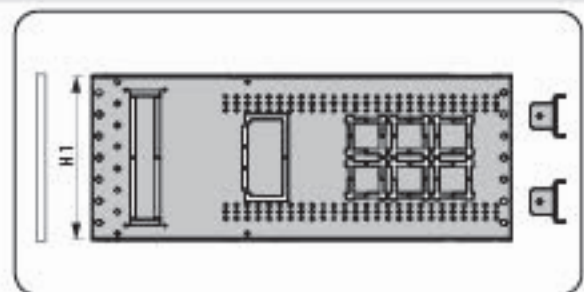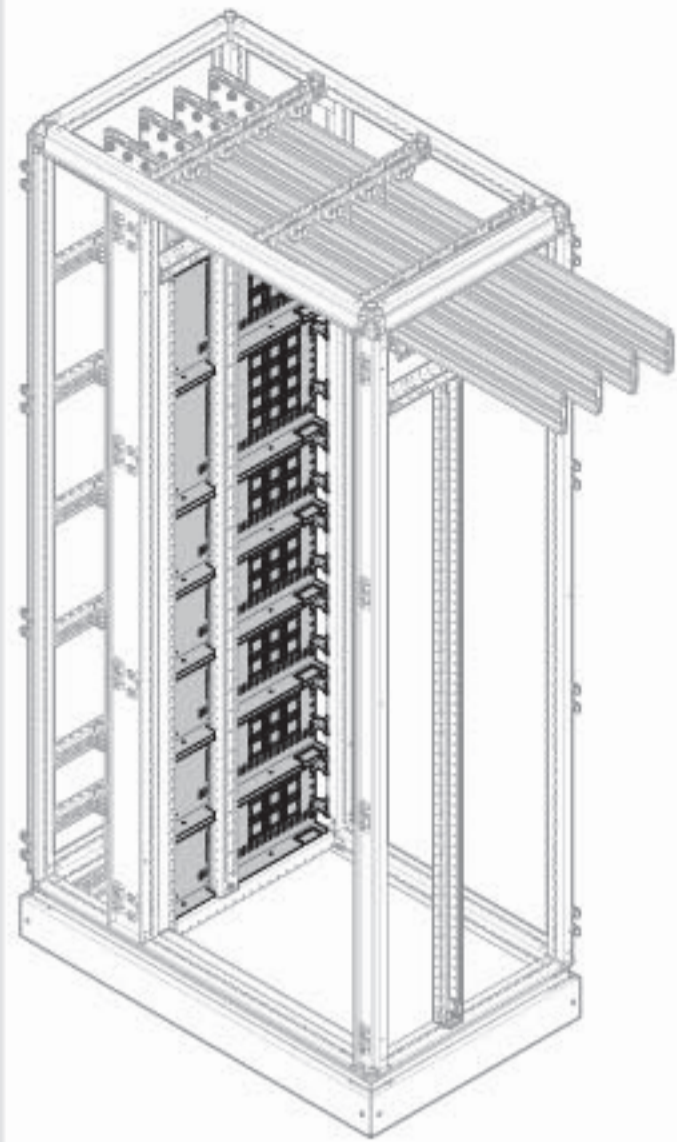
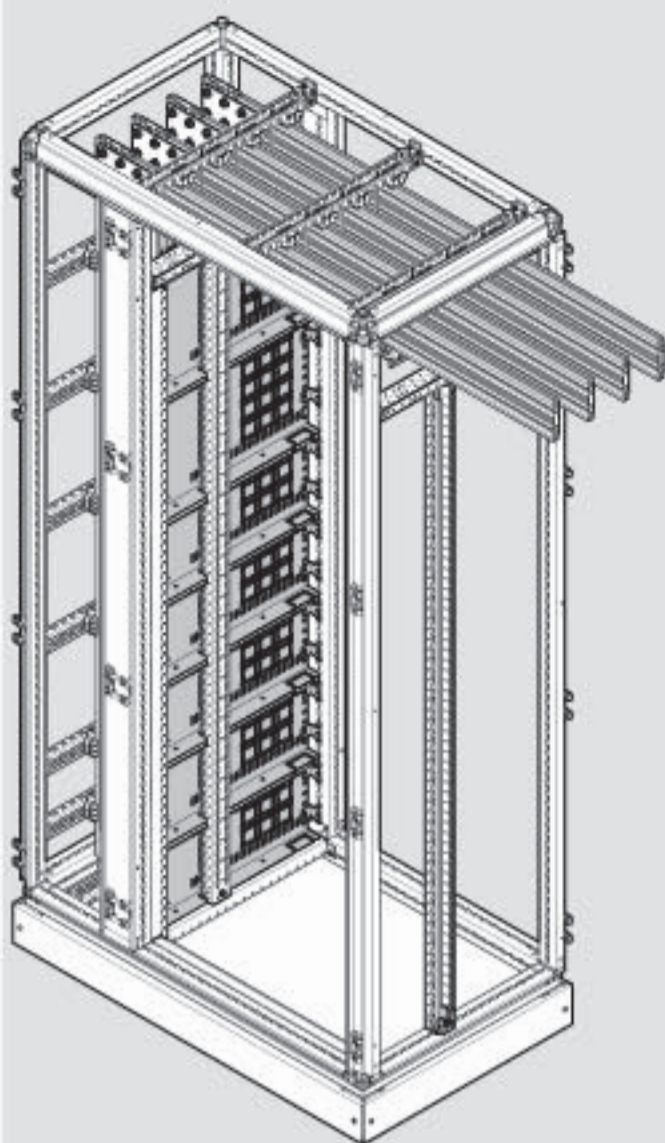


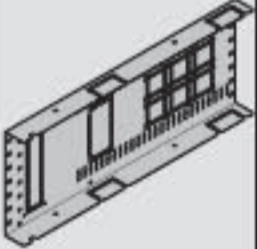
	W	H1	D
UC1040FUL	///	100	400
UC1060FUL	///	100	600
UC1080FUL	///	100	800
UC1540FUL	///	150	400
UC1560FUL	///	150	600
UC1580FUL	///	150	800
UC2040FUL	///	200	400
UC2060FUL	///	200	600
UC2080FUL	///	200	800
UC3040FUL	///	300	400
UC3060FUL	///	300	600
UC3080FUL	///	300	800
UC4040FUL	///	400	400
UC4060FUL	///	400	600
UC4080FUL	///	400	800
UC6040FUL	///	600	400
UC6060FUL	///	600	600
UC6080FUL	///	600	800

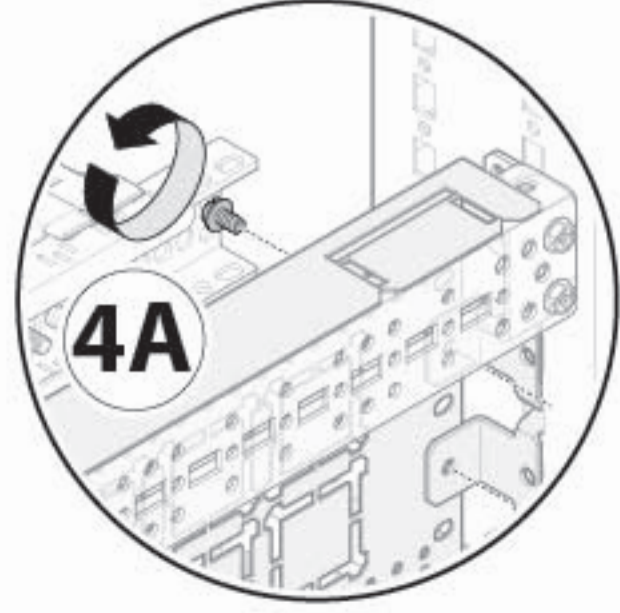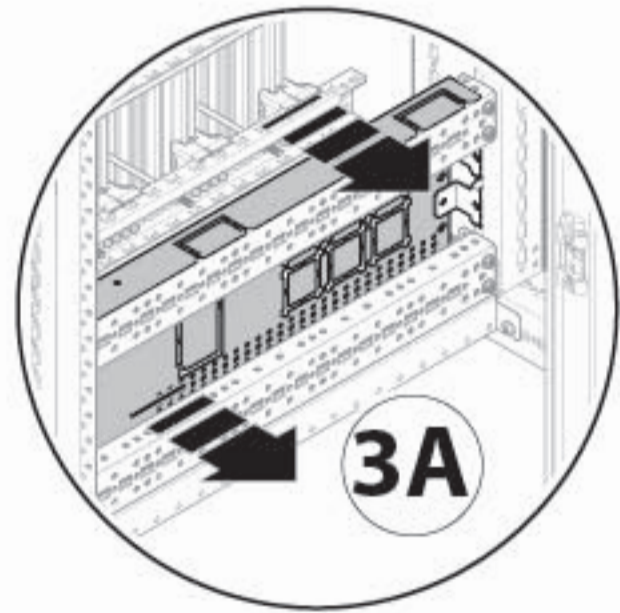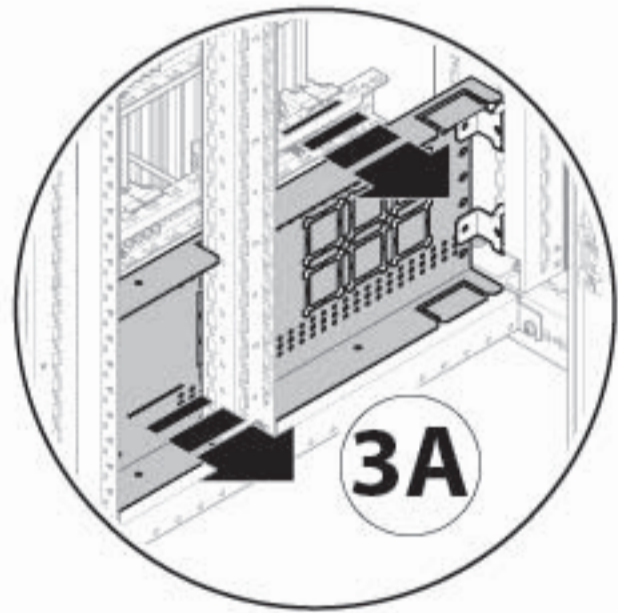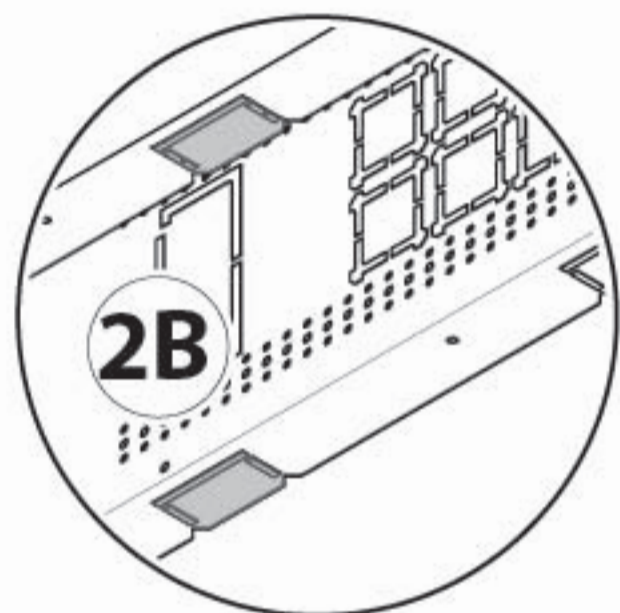
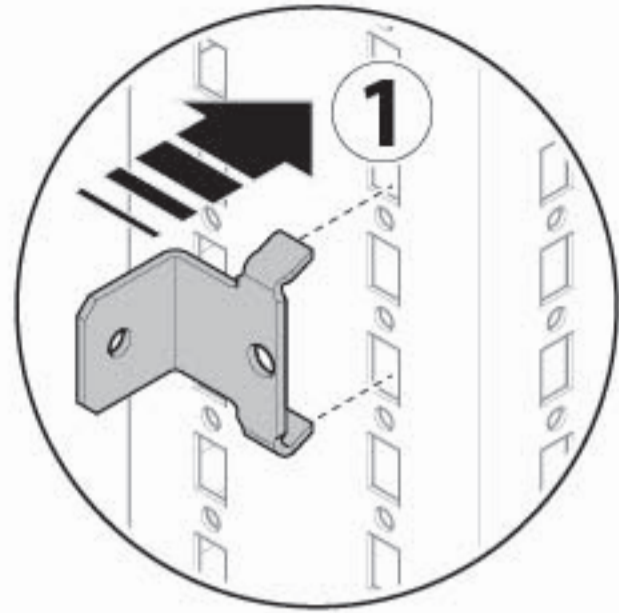


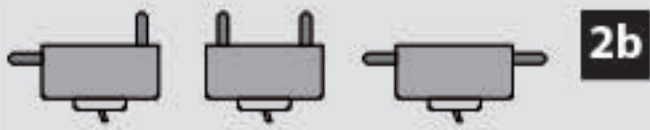


2b


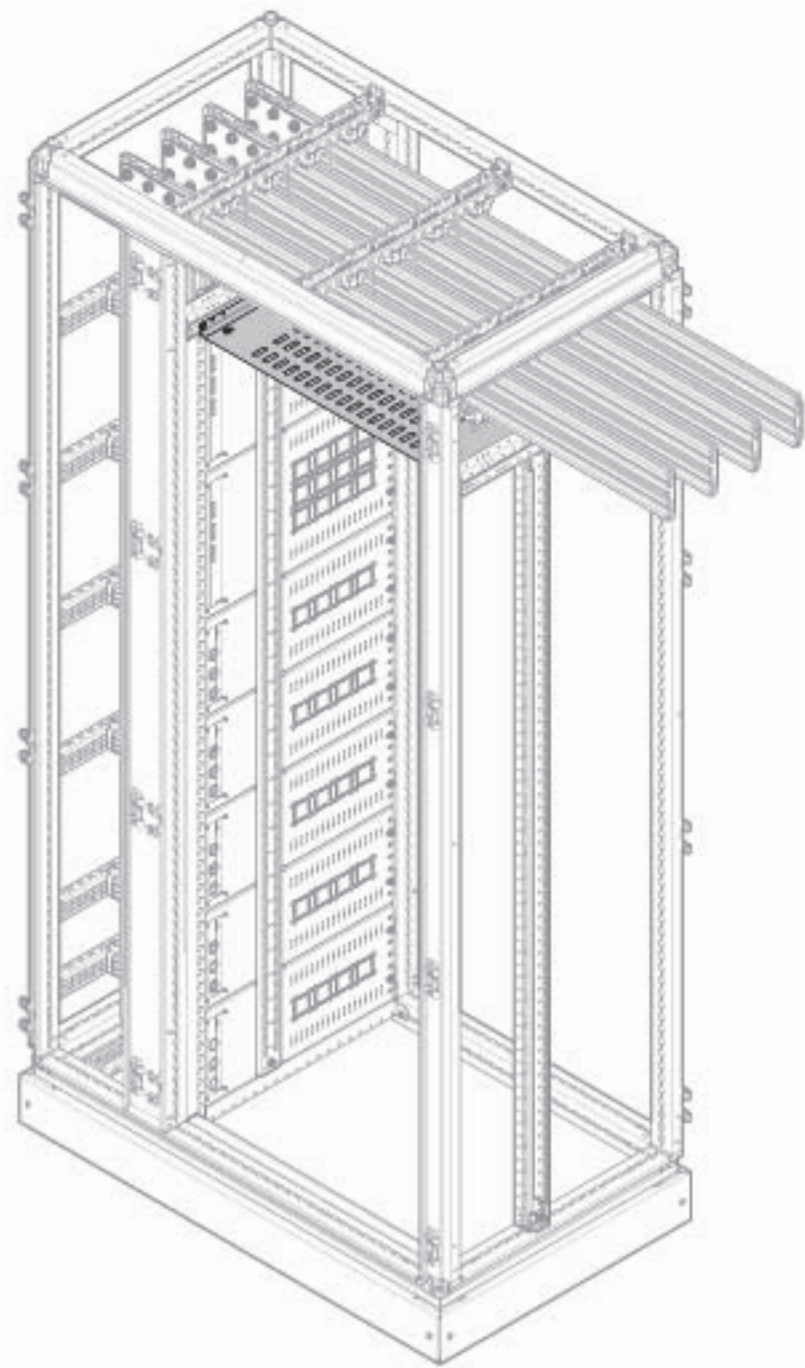
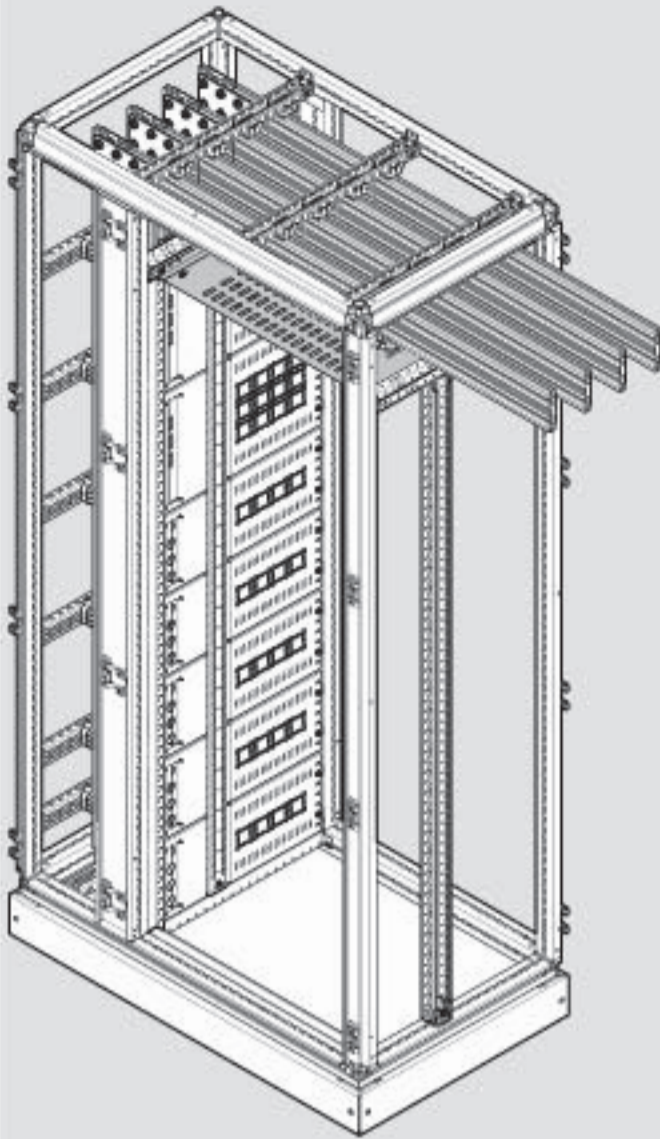


	W	H	D
UC3540FUH	350	///	400
UC3560FUH	350	///	600
UC3580FUH	350	///	800
UC6040FUH	600	///	400
UC6060FUH	600	///	600
UC6080FUH	600	///	800
UC8040FUH	800	///	400
UC8060FUH	800	///	600
UC8080FUH	800	///	800

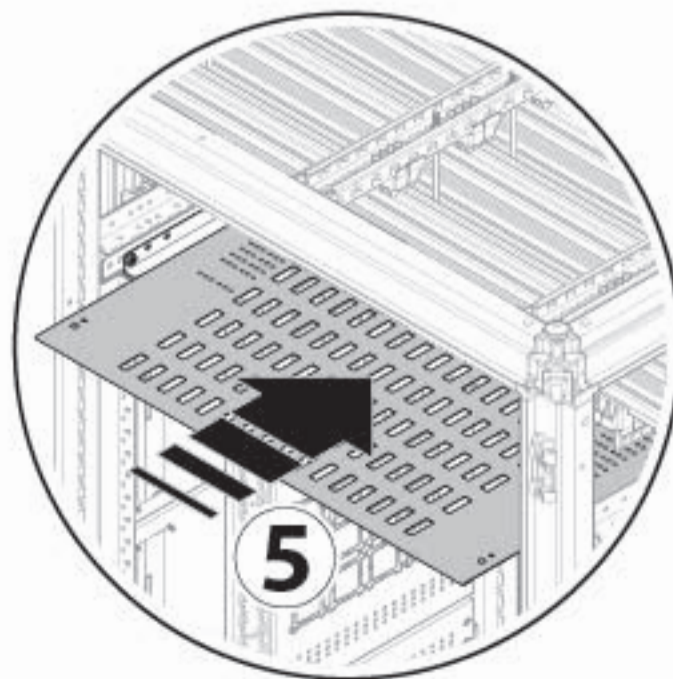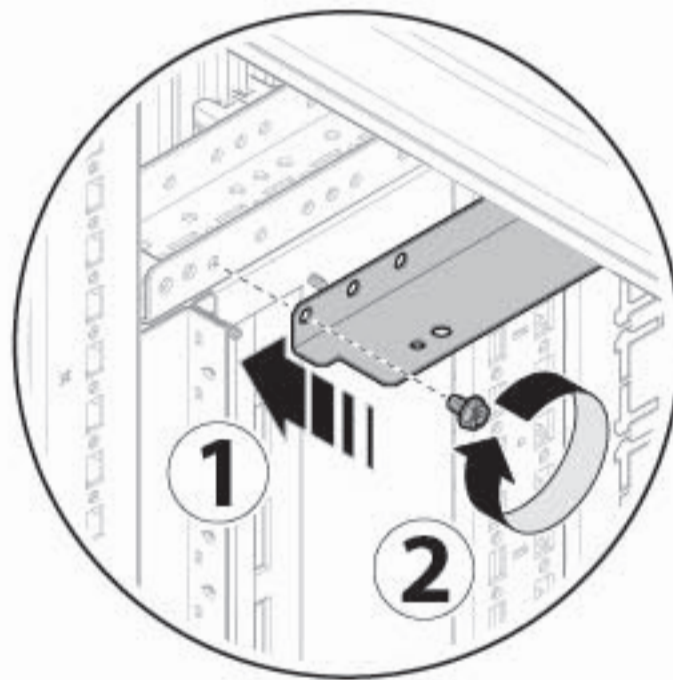


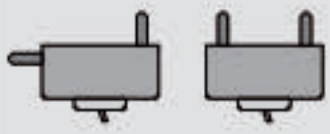


2b > 3b

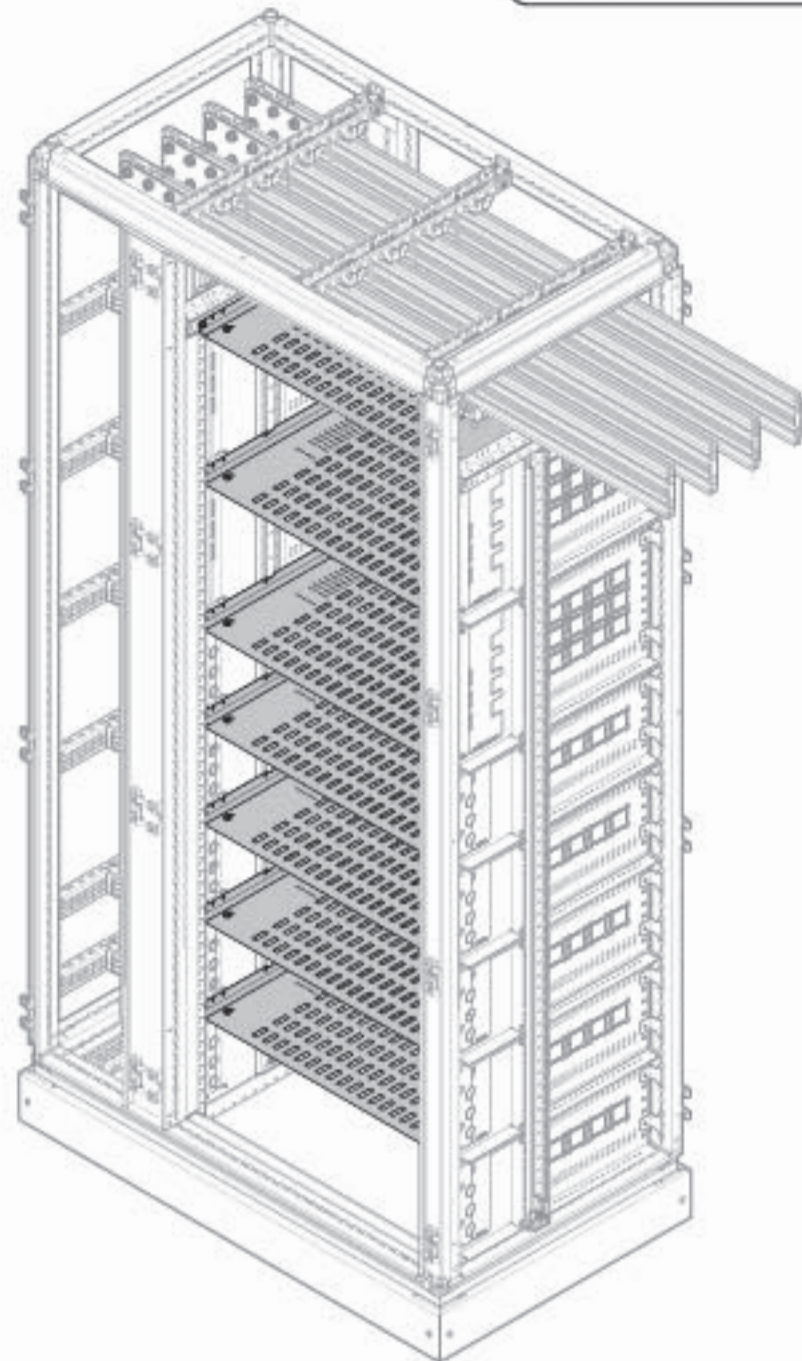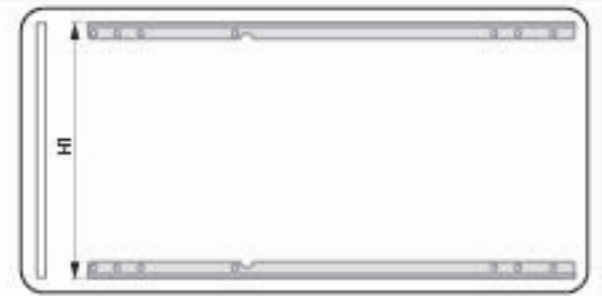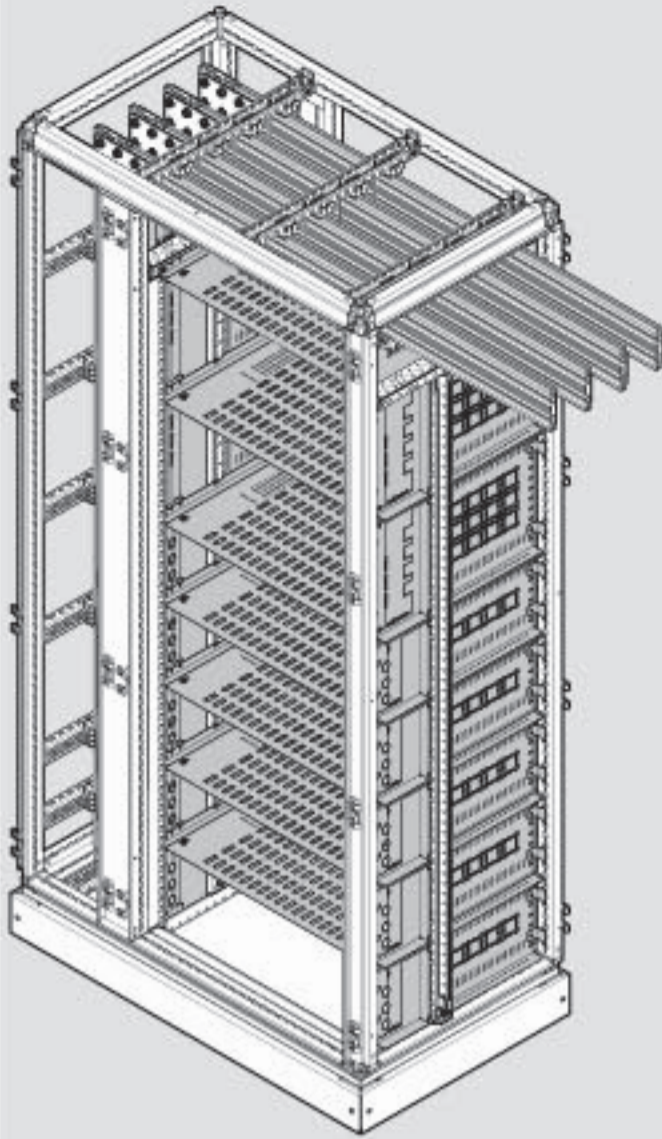







W H D


UC3040FUH	300	///	400
UC3060FUH	300	///	600
UC3080FUH	300	///	800
UC3540FUH	350	///	400
UC3560FUH	350	///	600
UC3580FUH	350	///	800
UC6040FUH	600	///	400
UC6060FUH	600	///	600
UC6080FUH	600	///	800
UC8040FUH	800	///	400
UC8060FUH	800	///	600
UC8080FUH	800	///	800

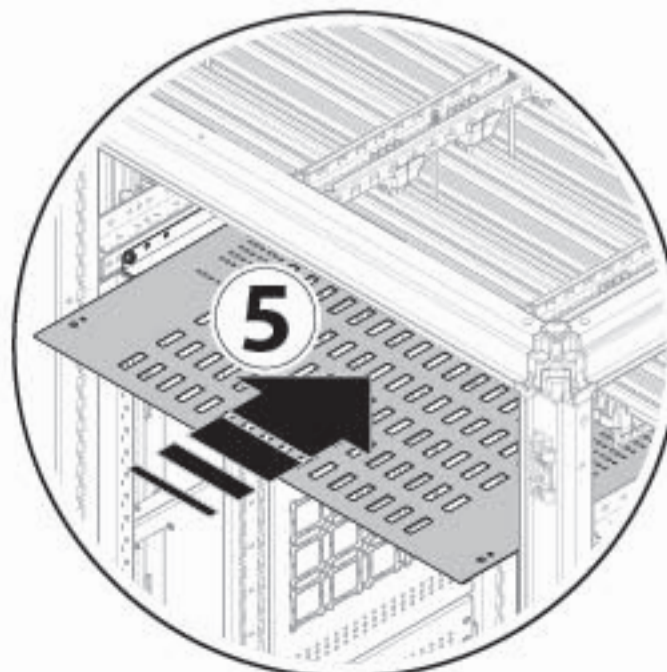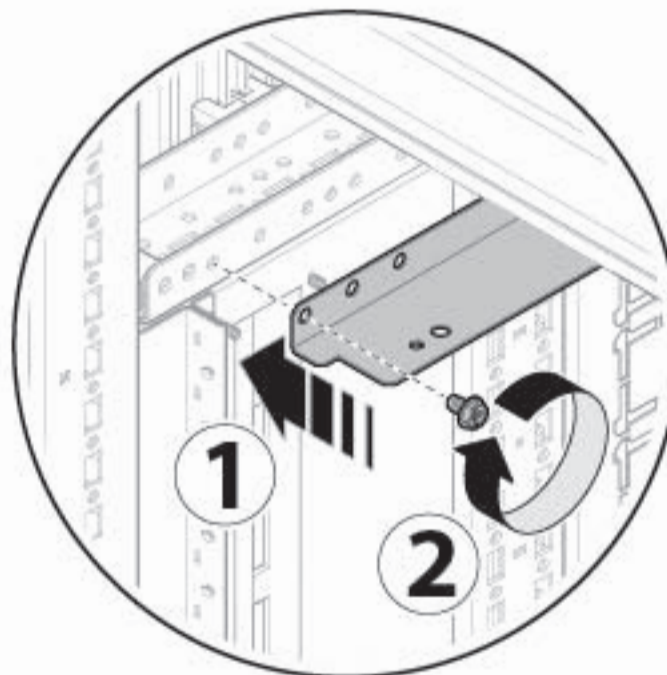





2b > 3b

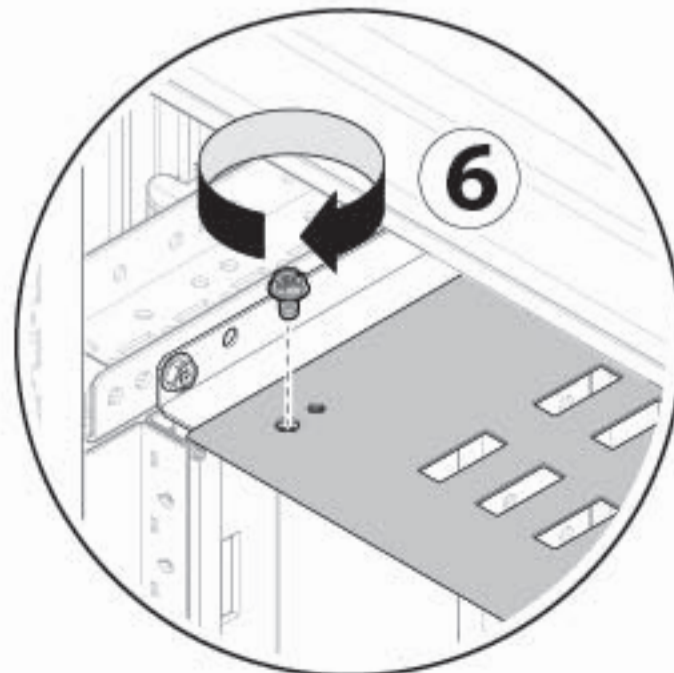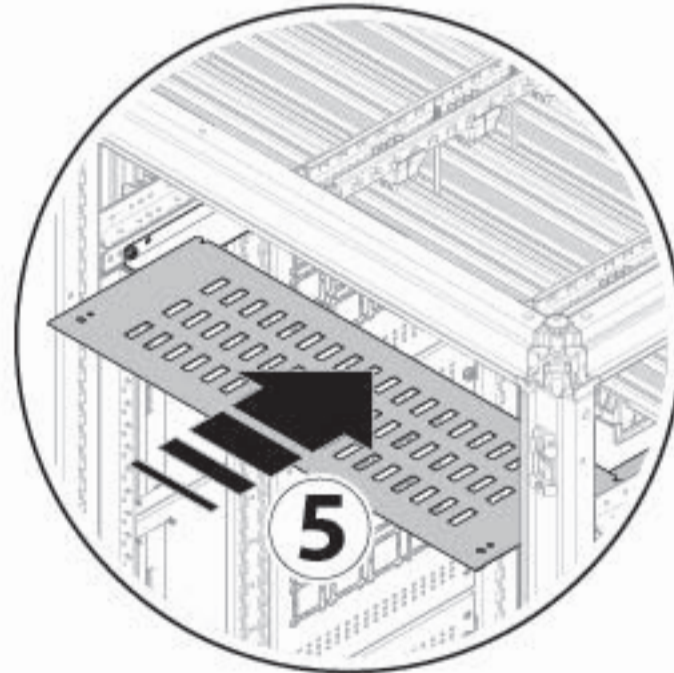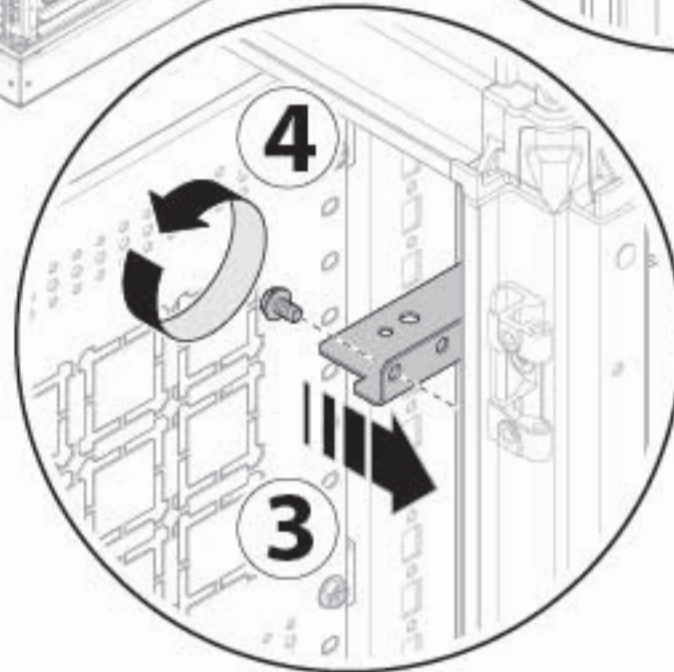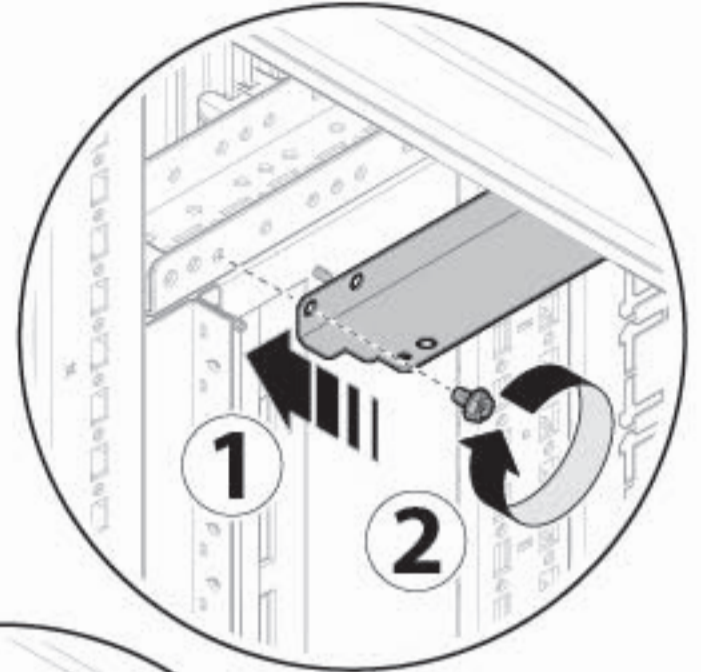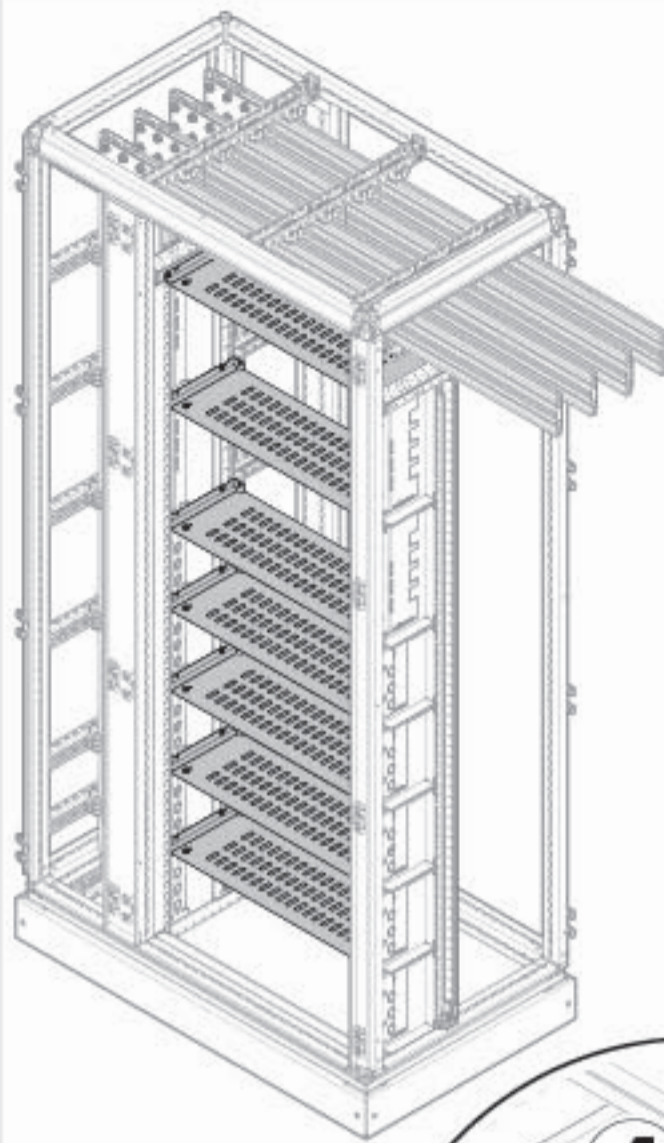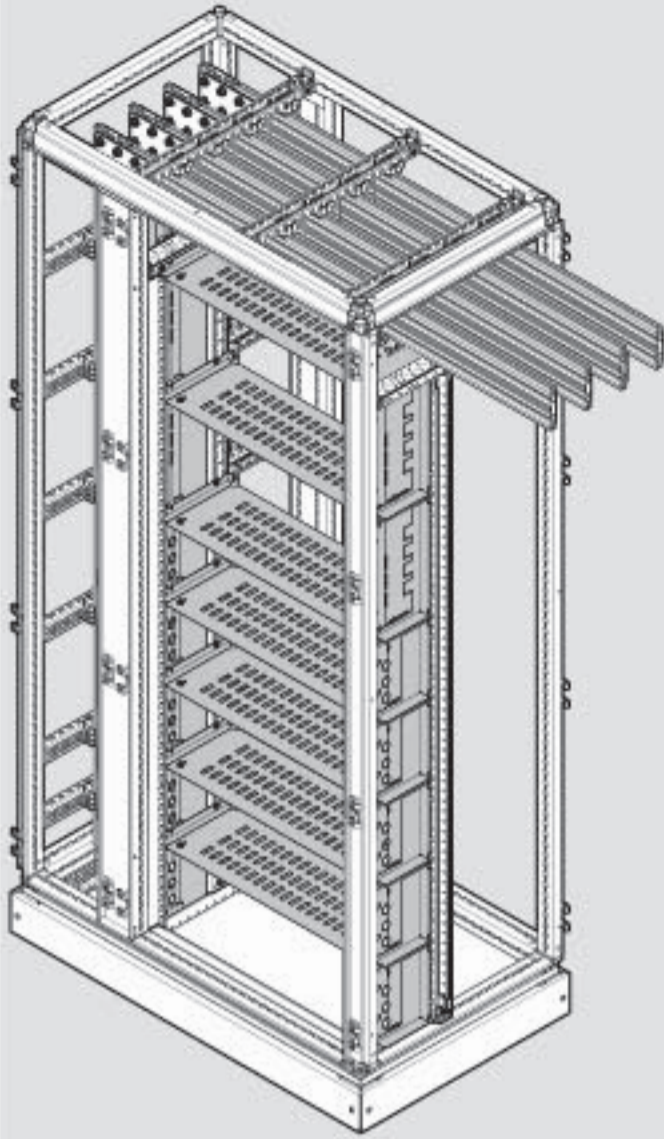



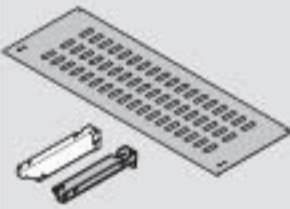
	W	H	D
UC350FH	350	///	///
UC600FH	600	///	///
UC800FH	800	///	///




3b

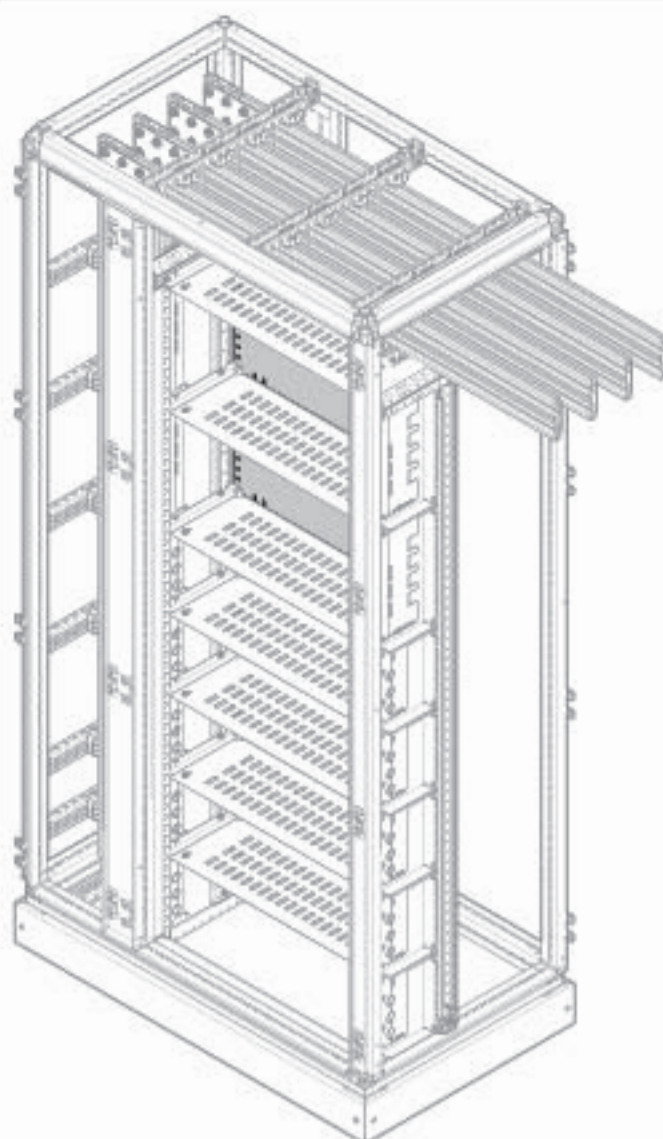
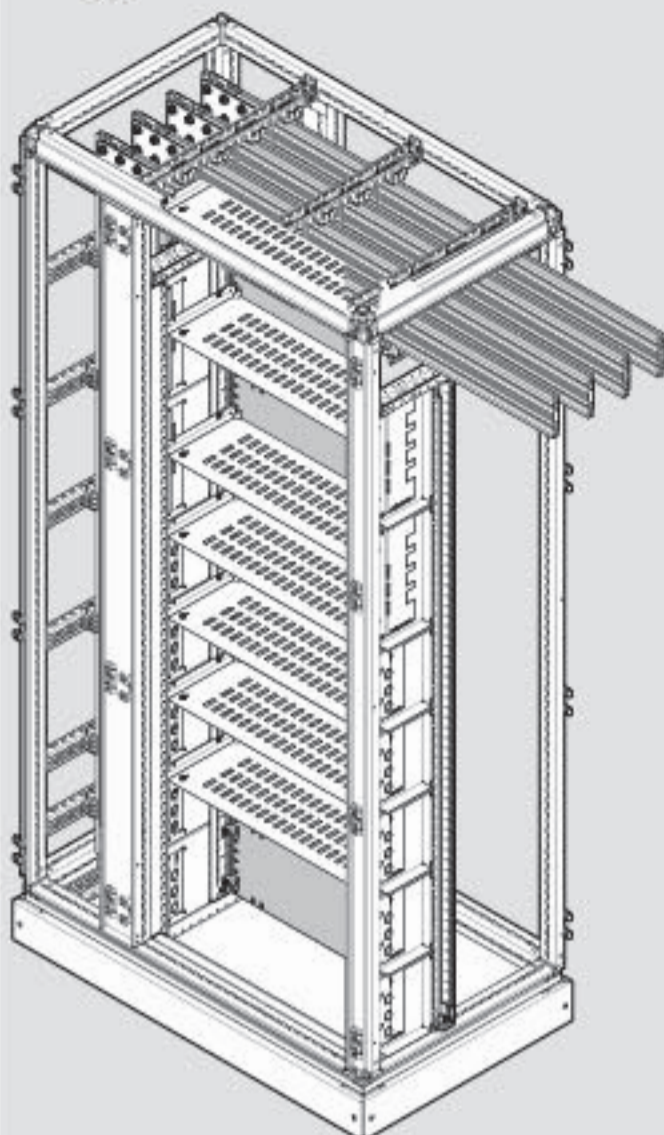


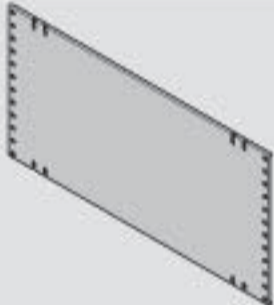	W	H
UC6015V	600	150
UC6020V	600	200
UC6030V	600	300
UC6040V	600	400
UC6060V	600	600
UC8015V	800	150
UC8020V	800	200
UC8030V	800	300
UC8040V	800	400
UC8060V	800	600

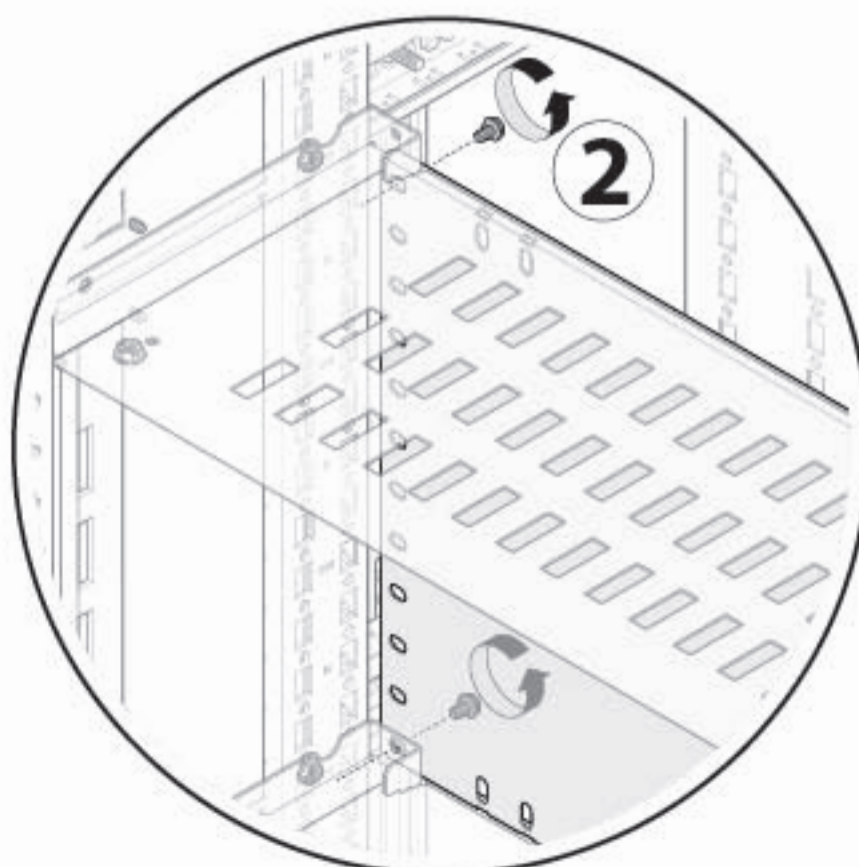
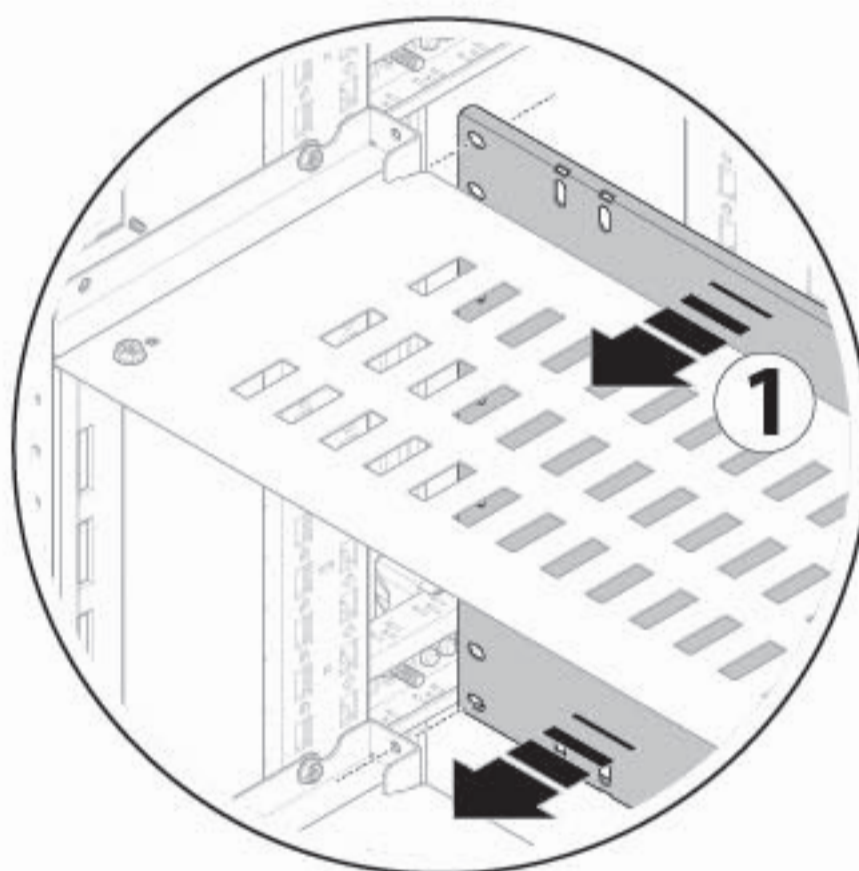


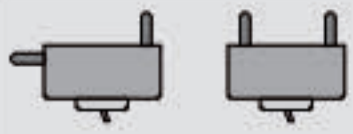

3b

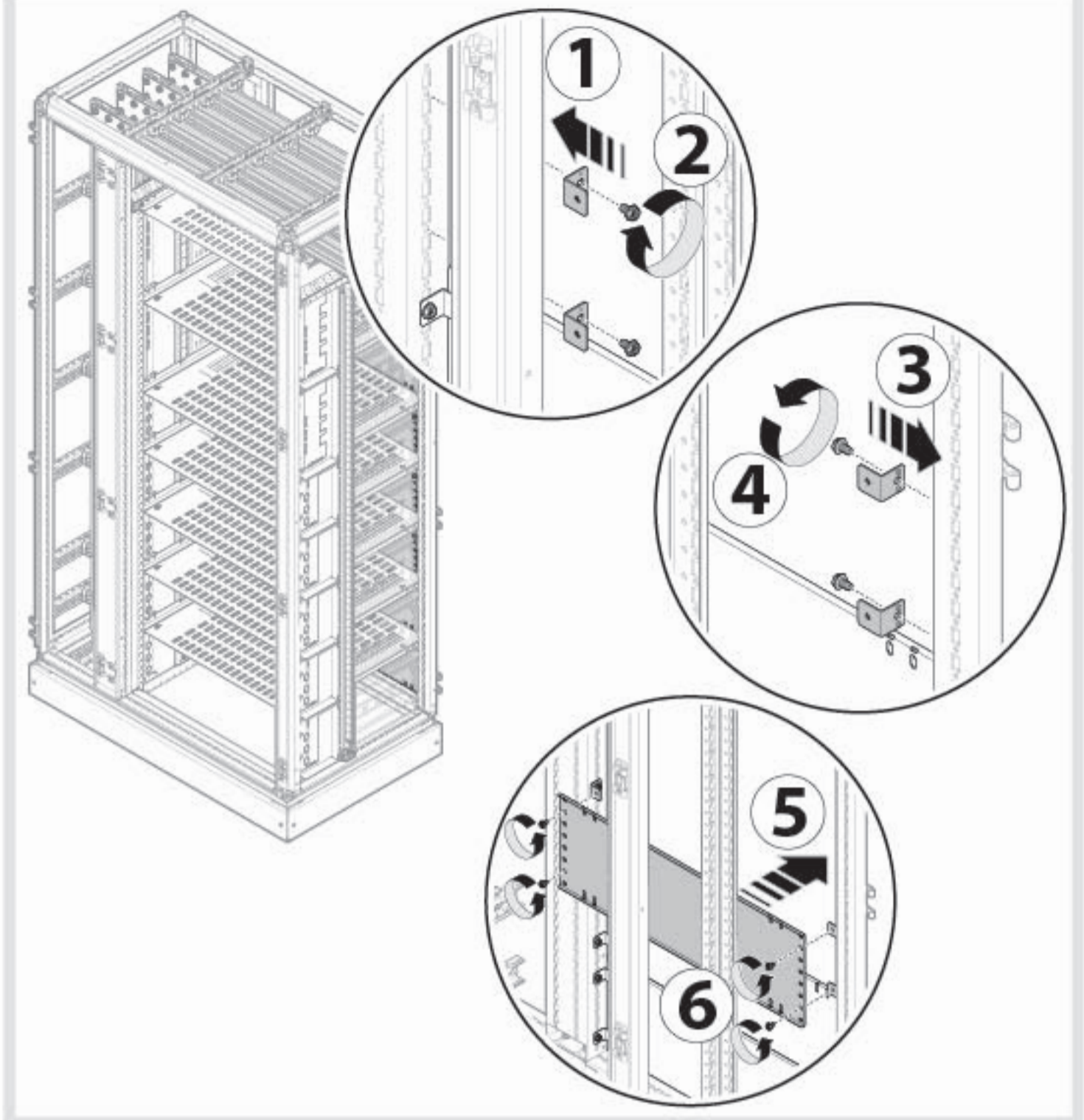
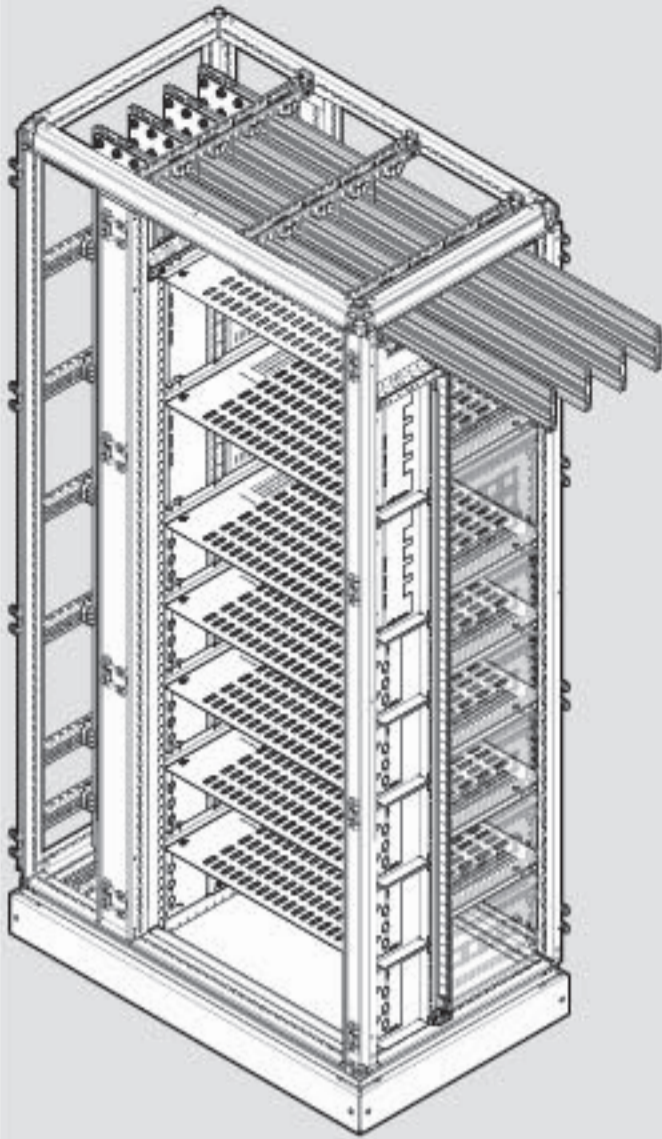


3b > 4b

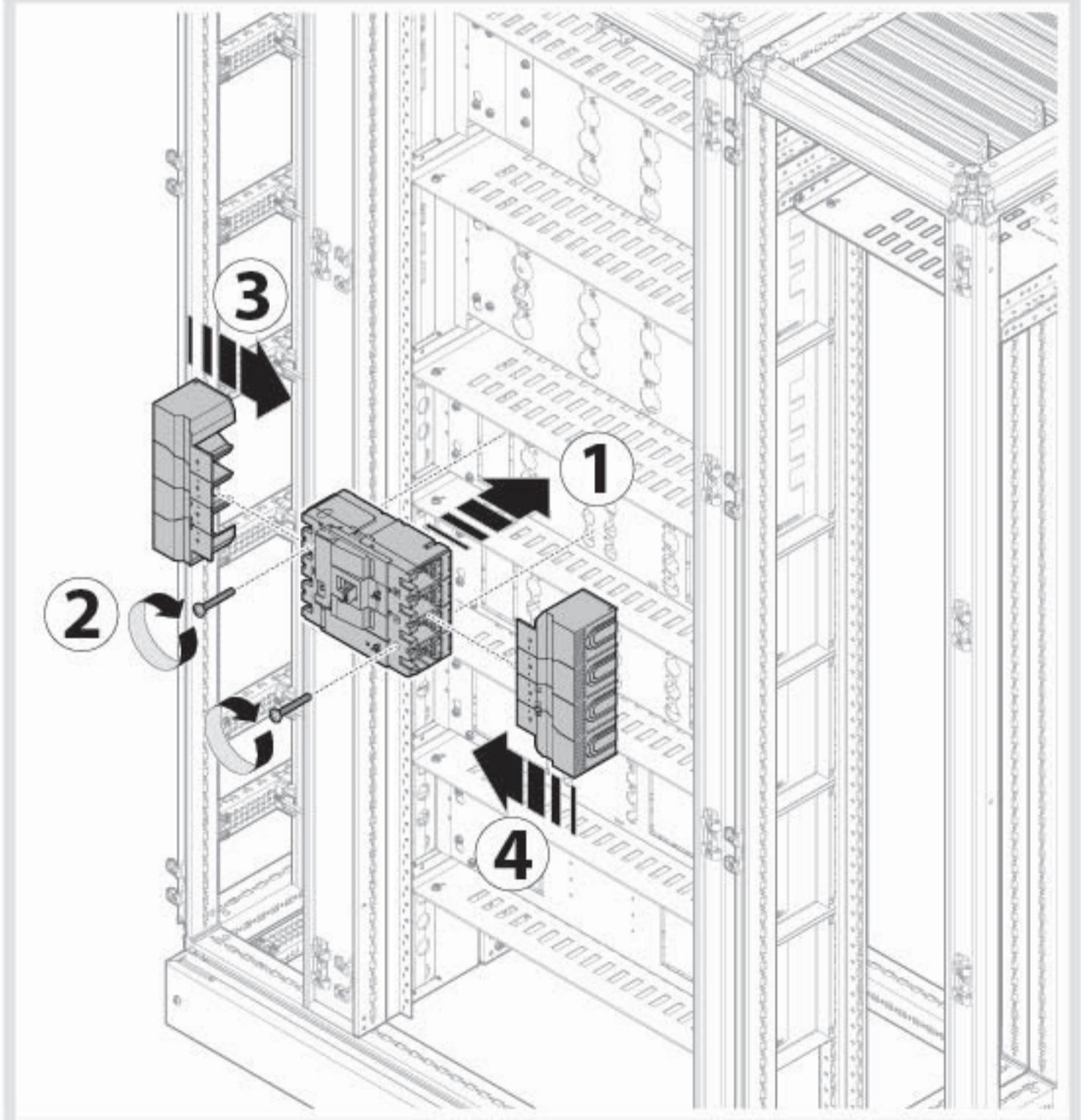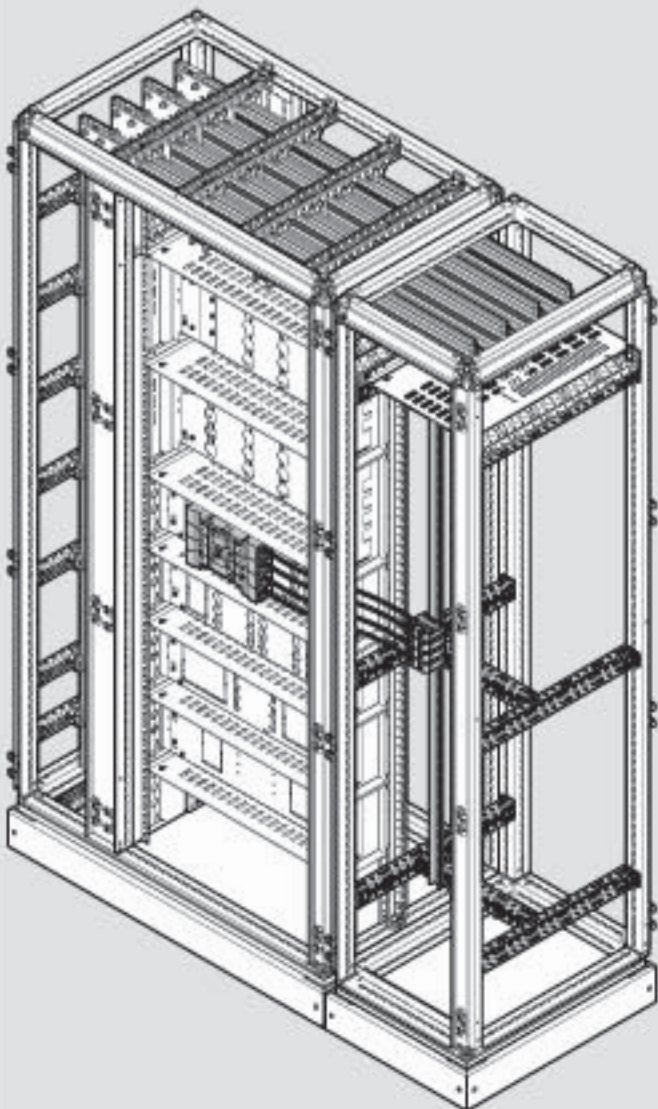




4b



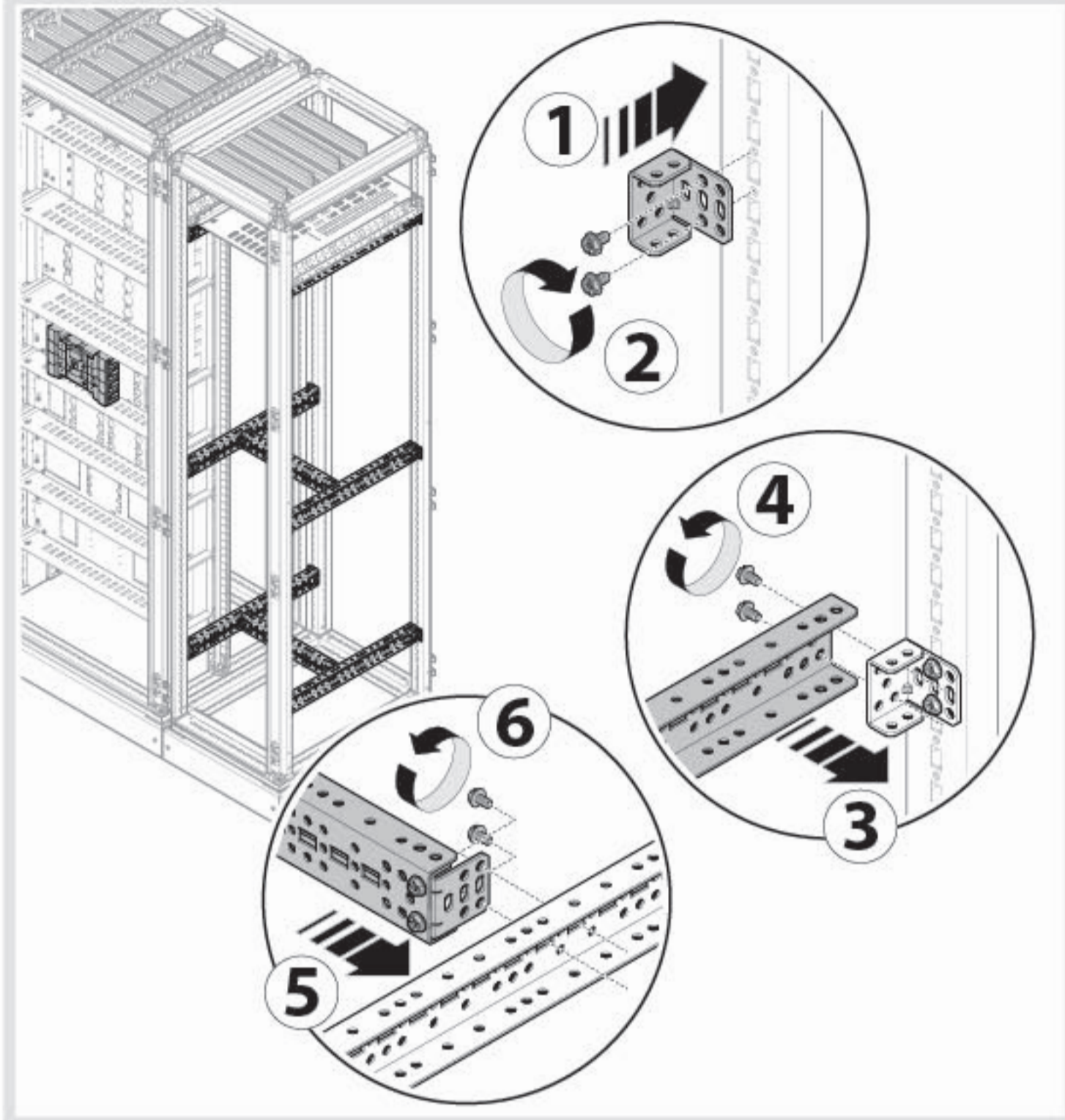
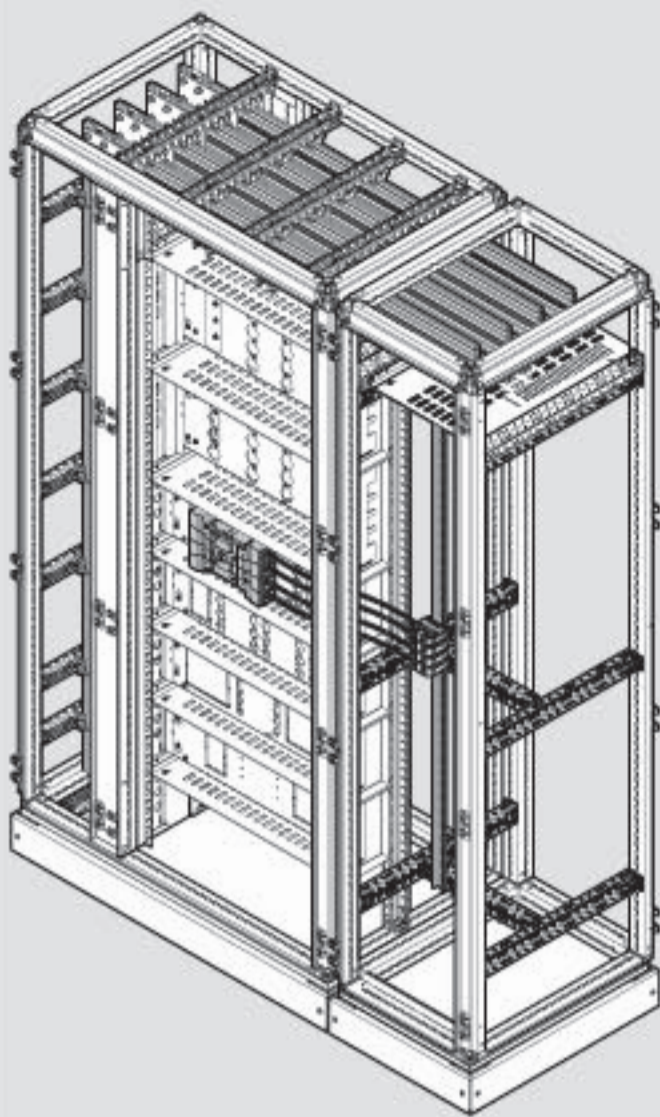



A099B

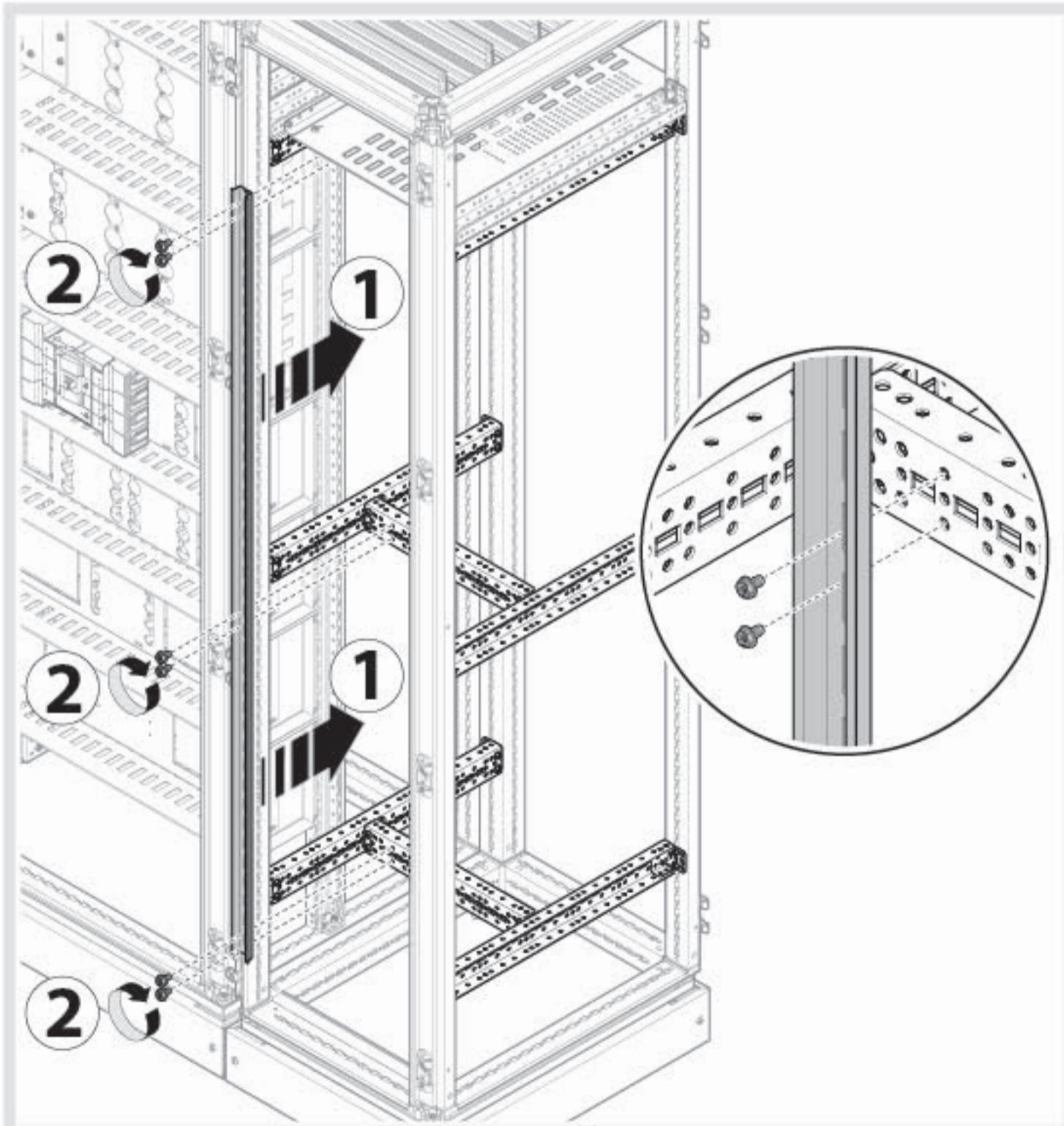







4b

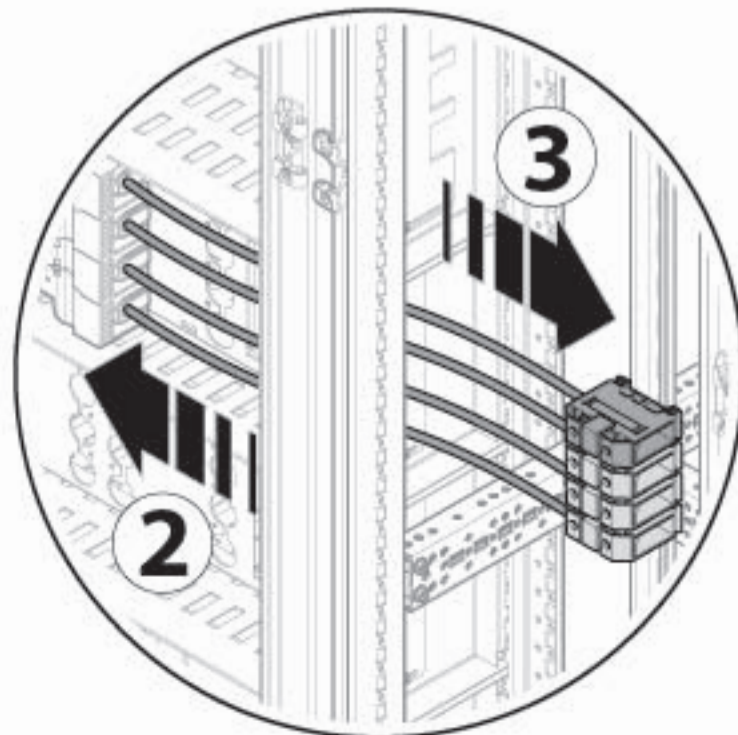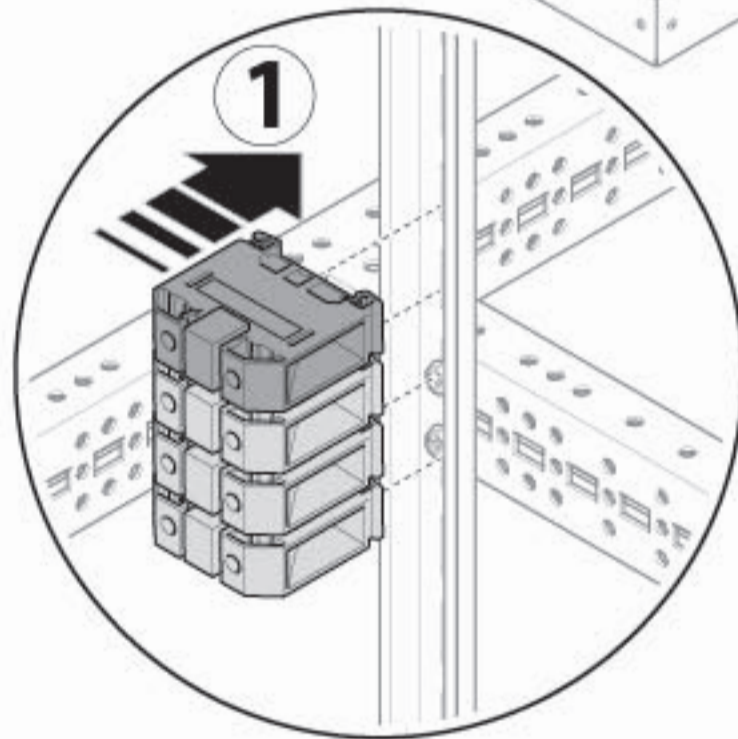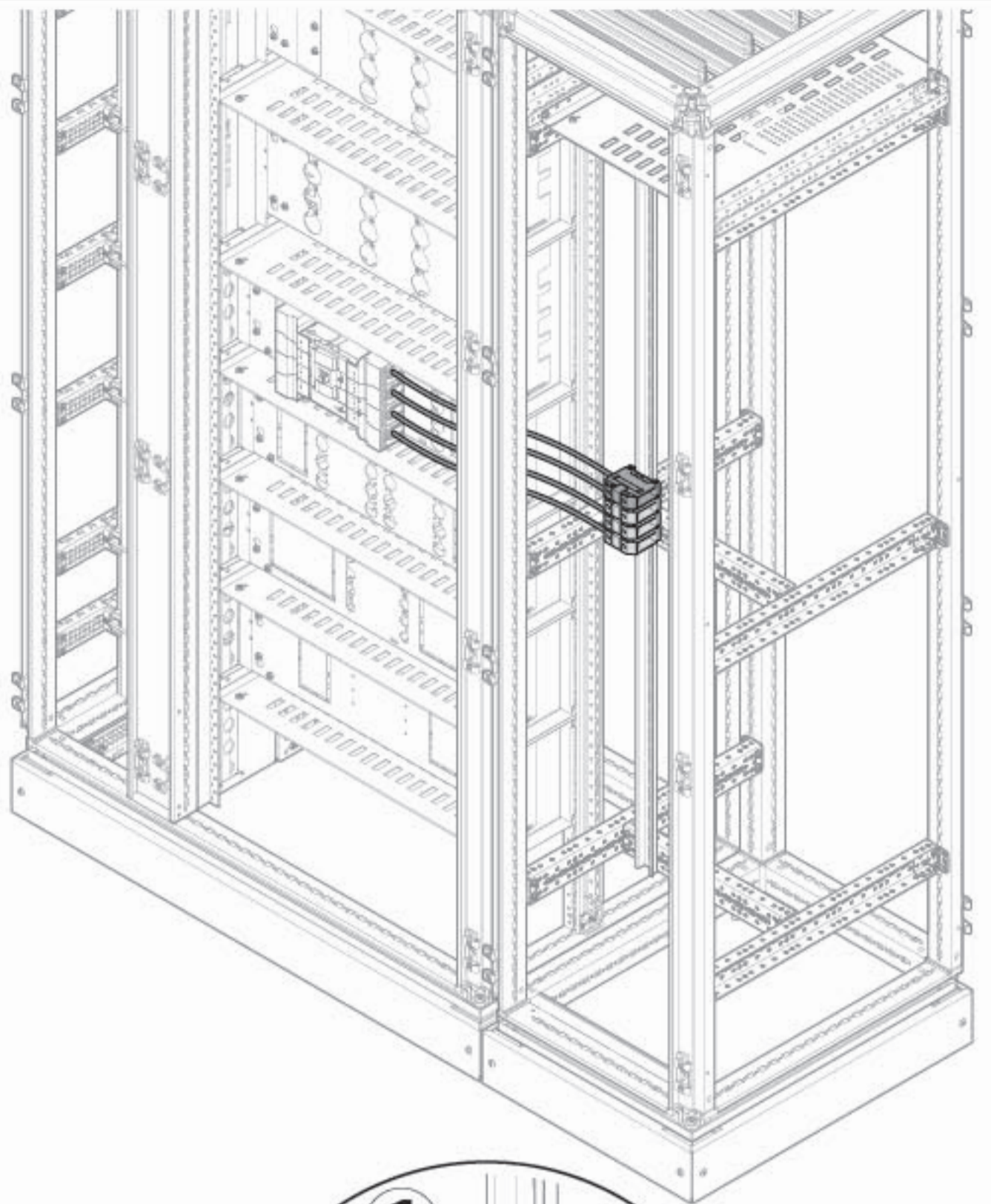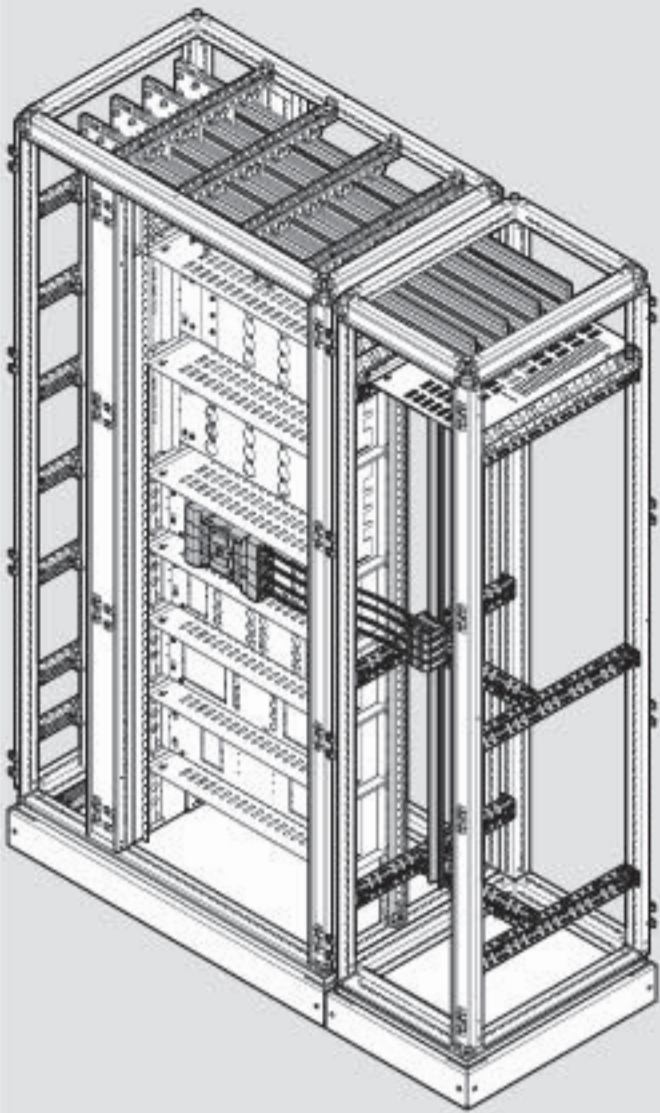



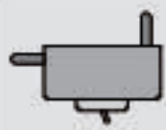


4b

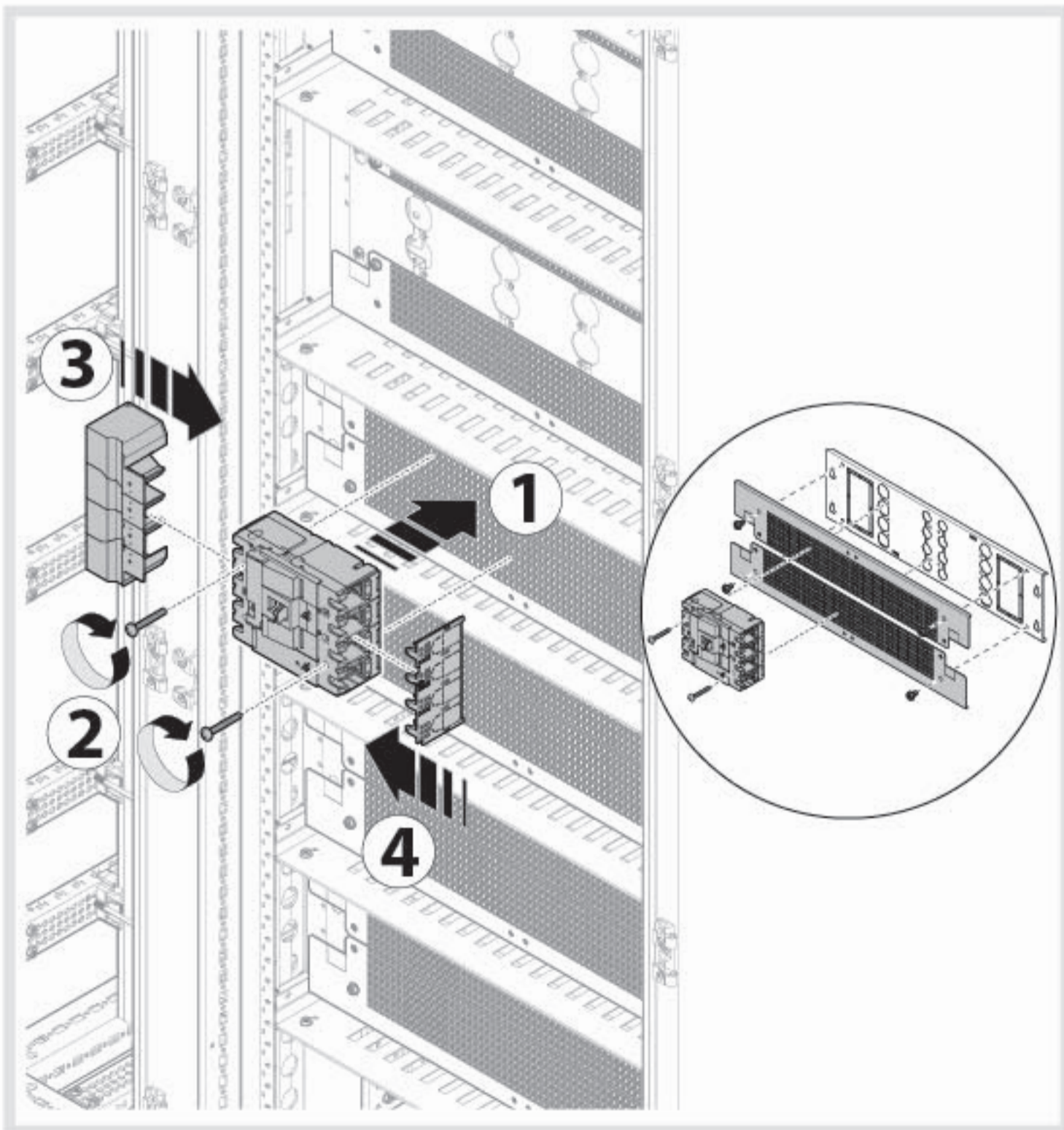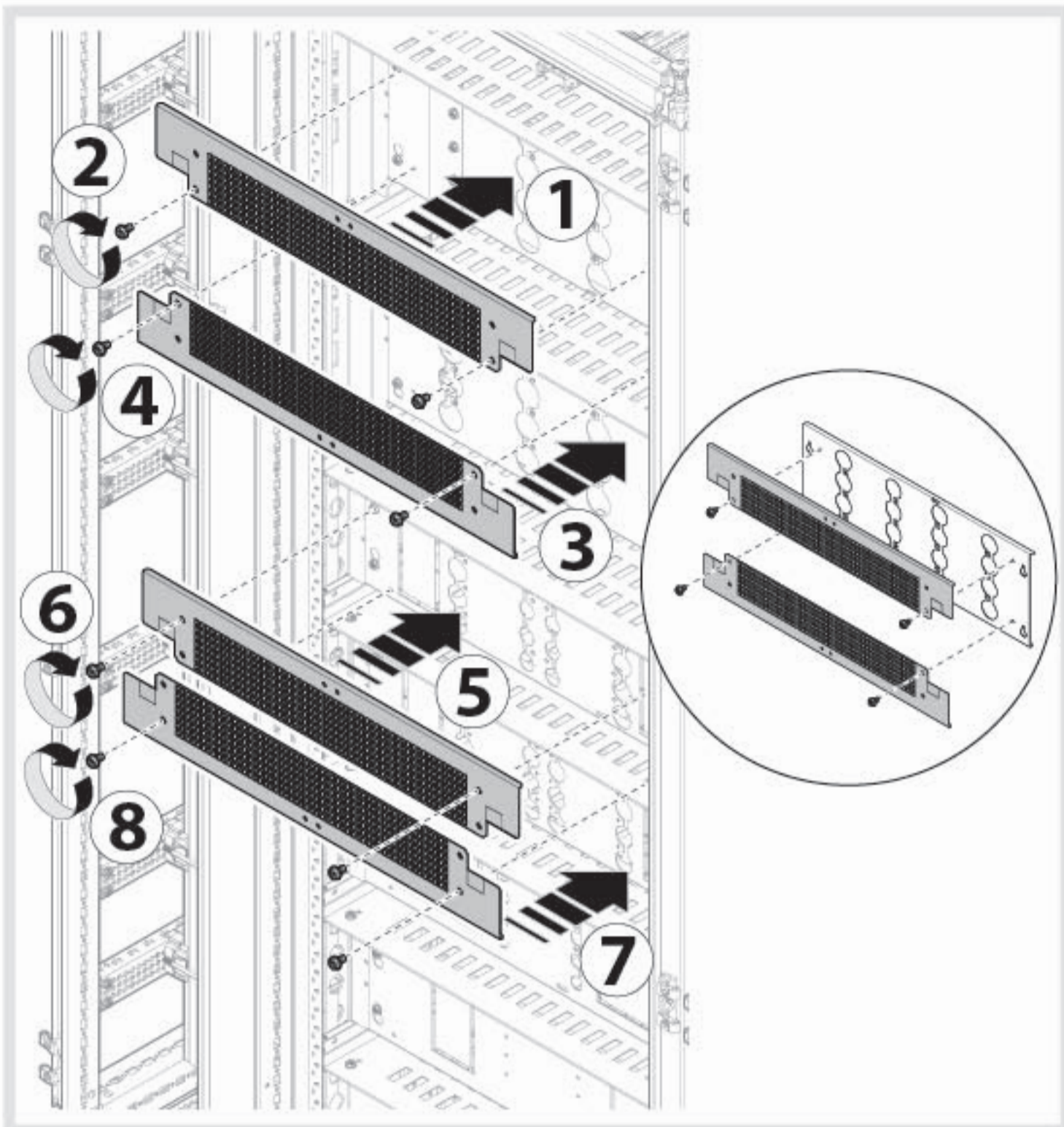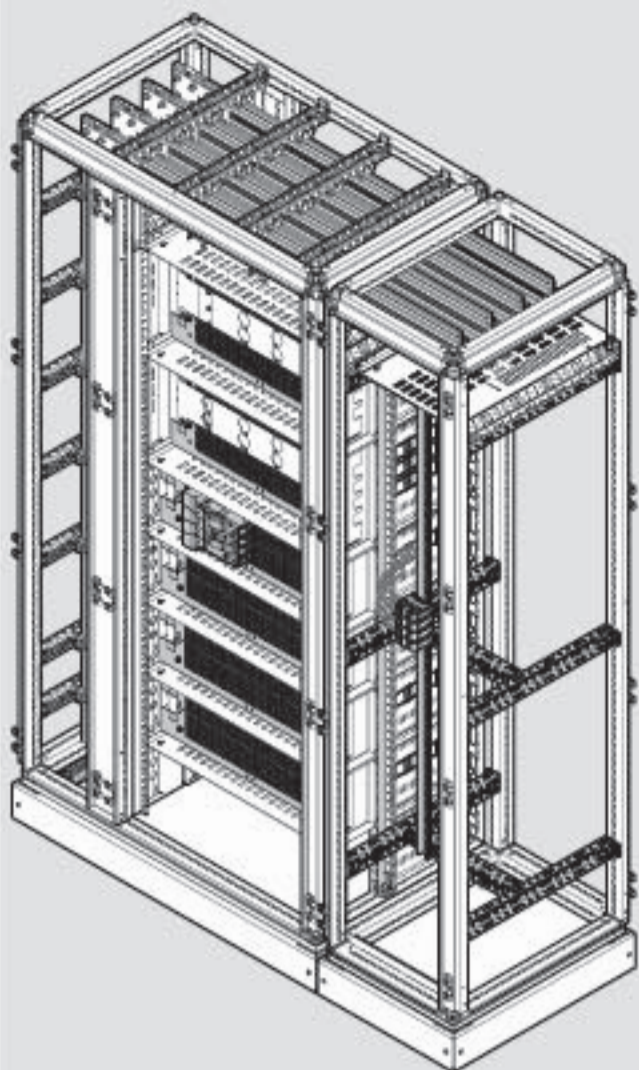




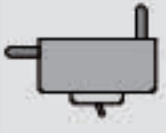


4b

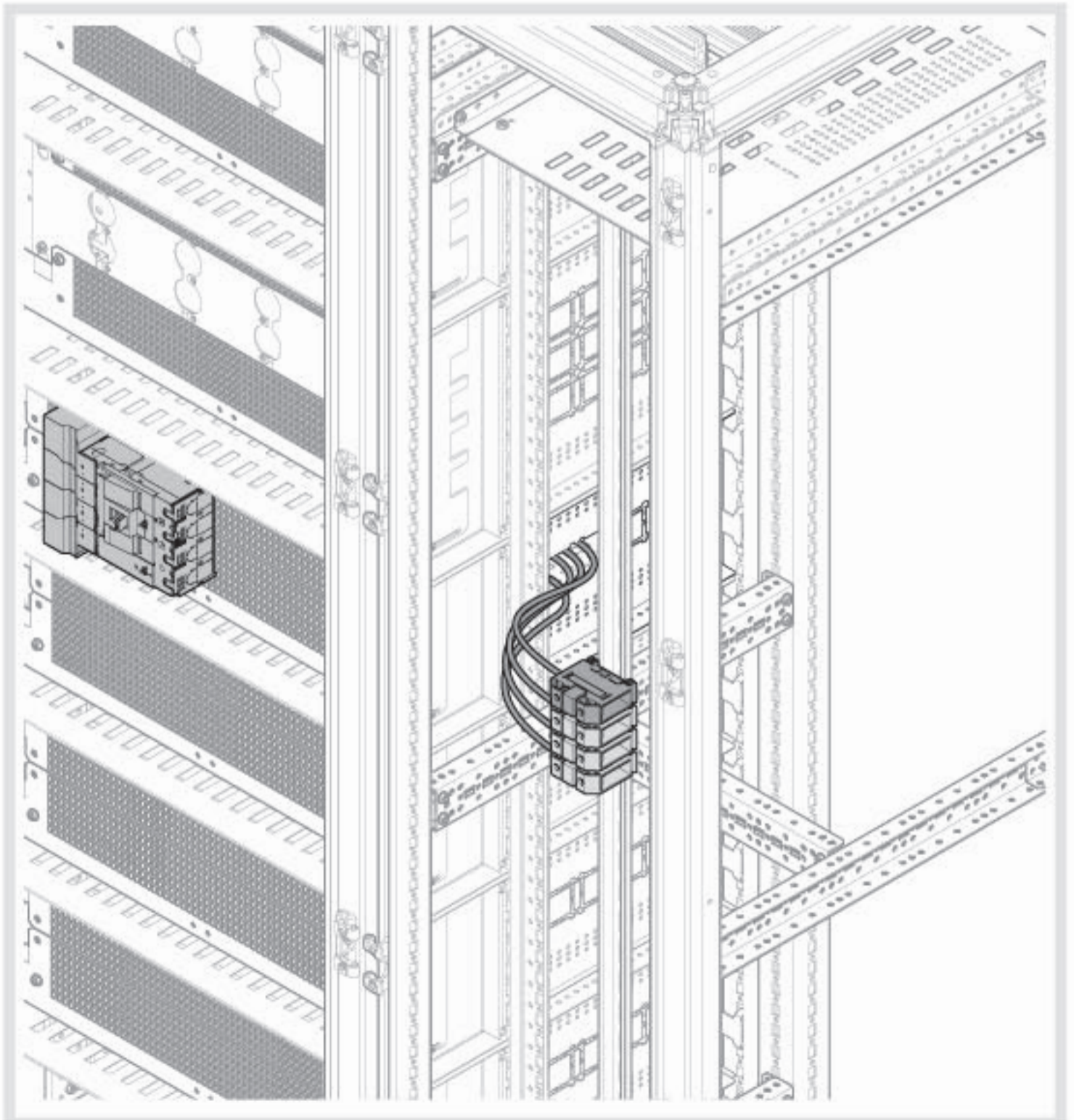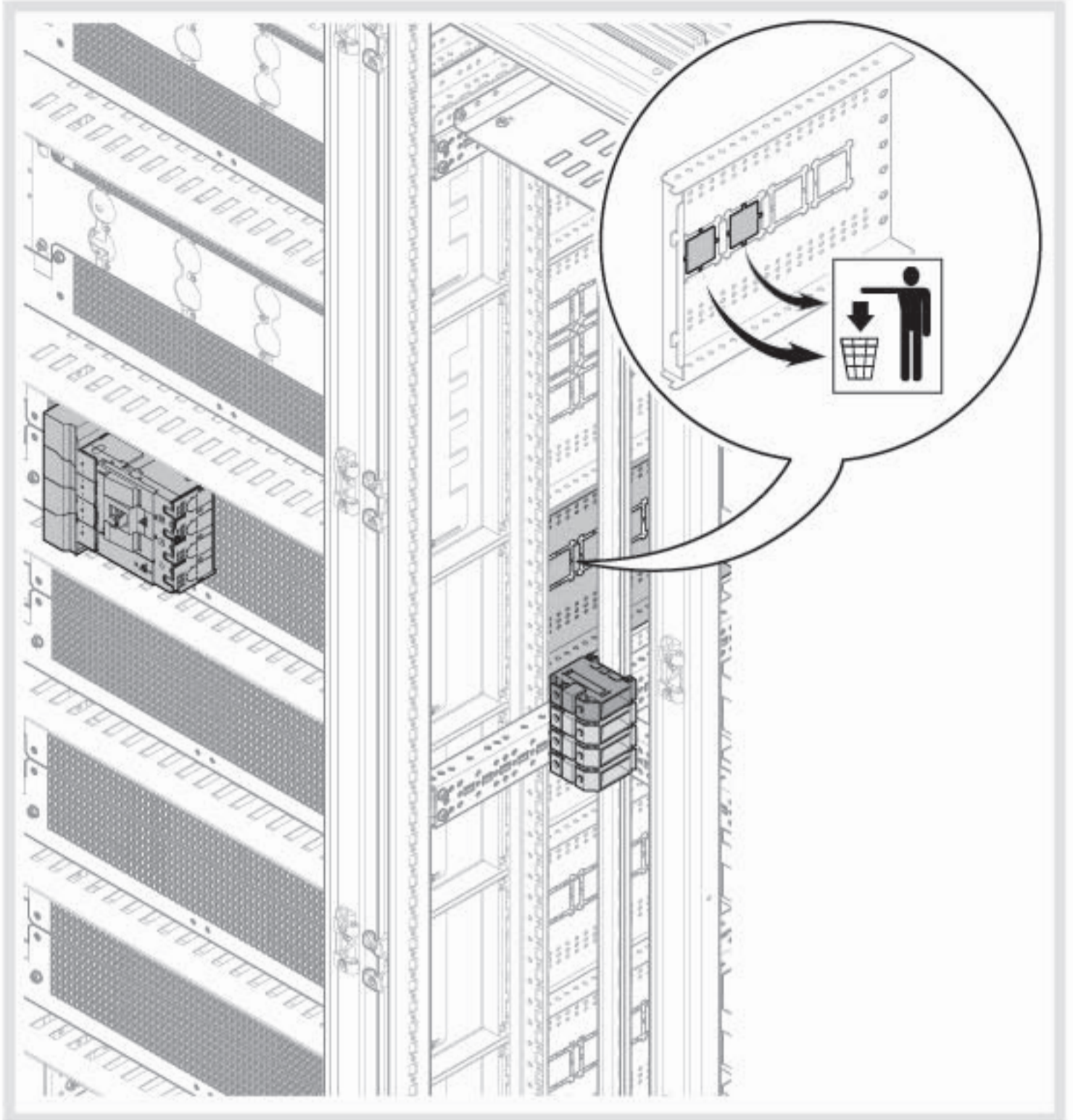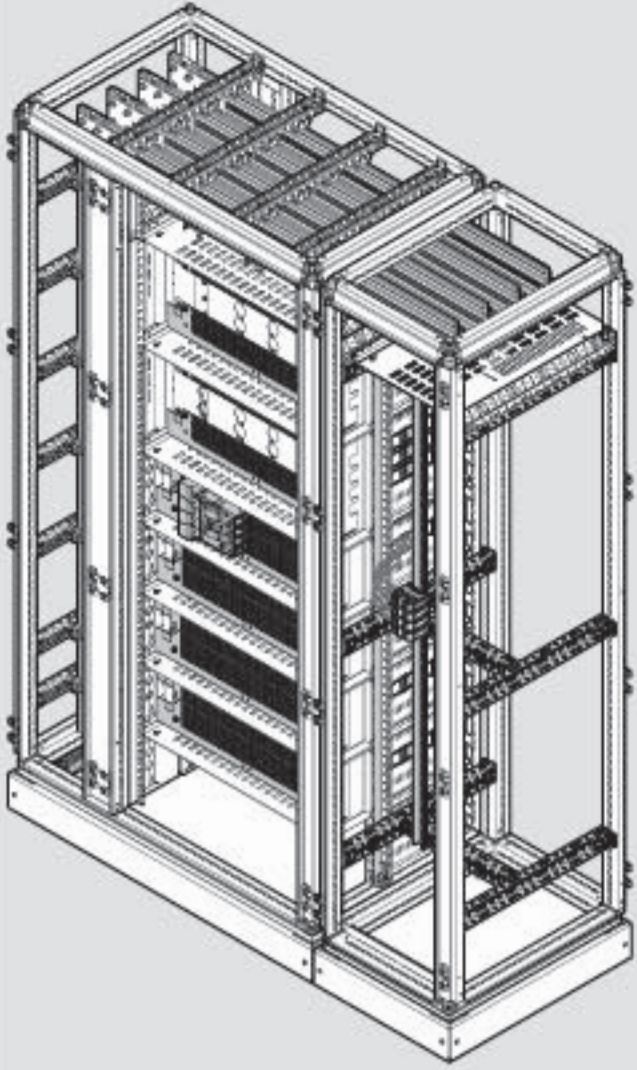






4b

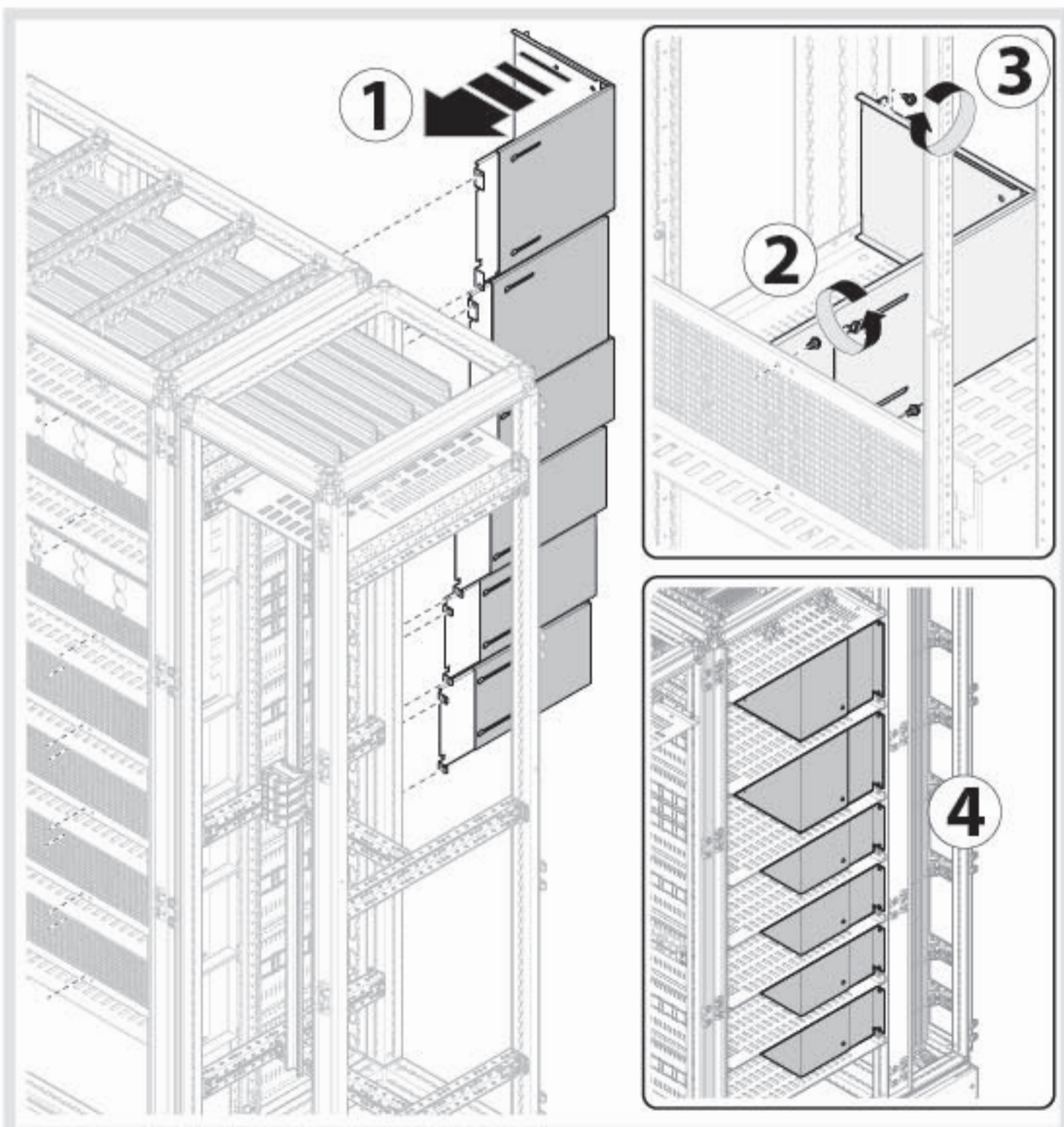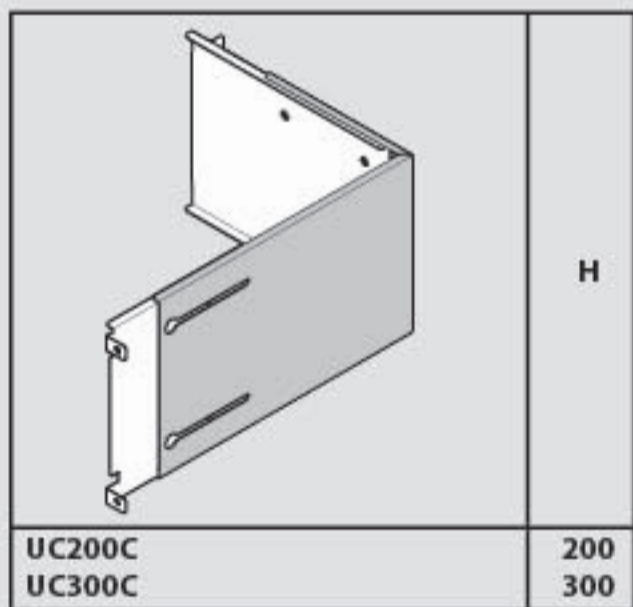
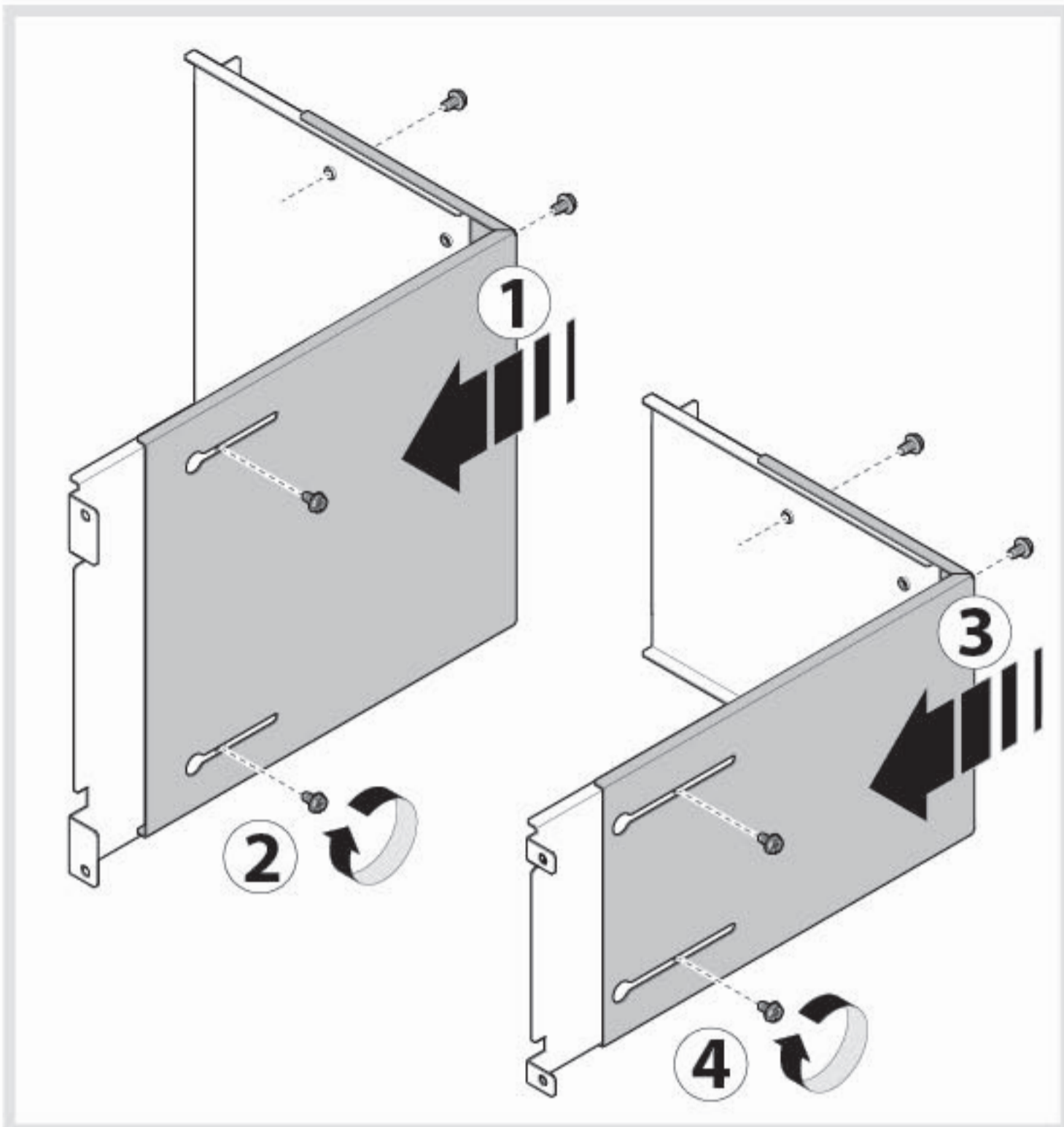
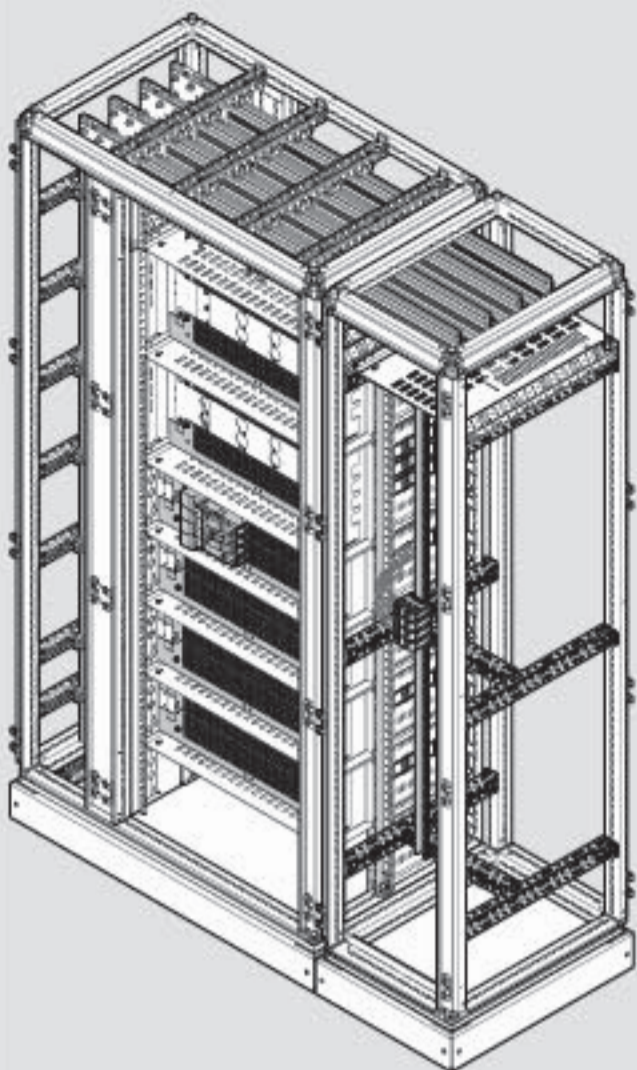




4b

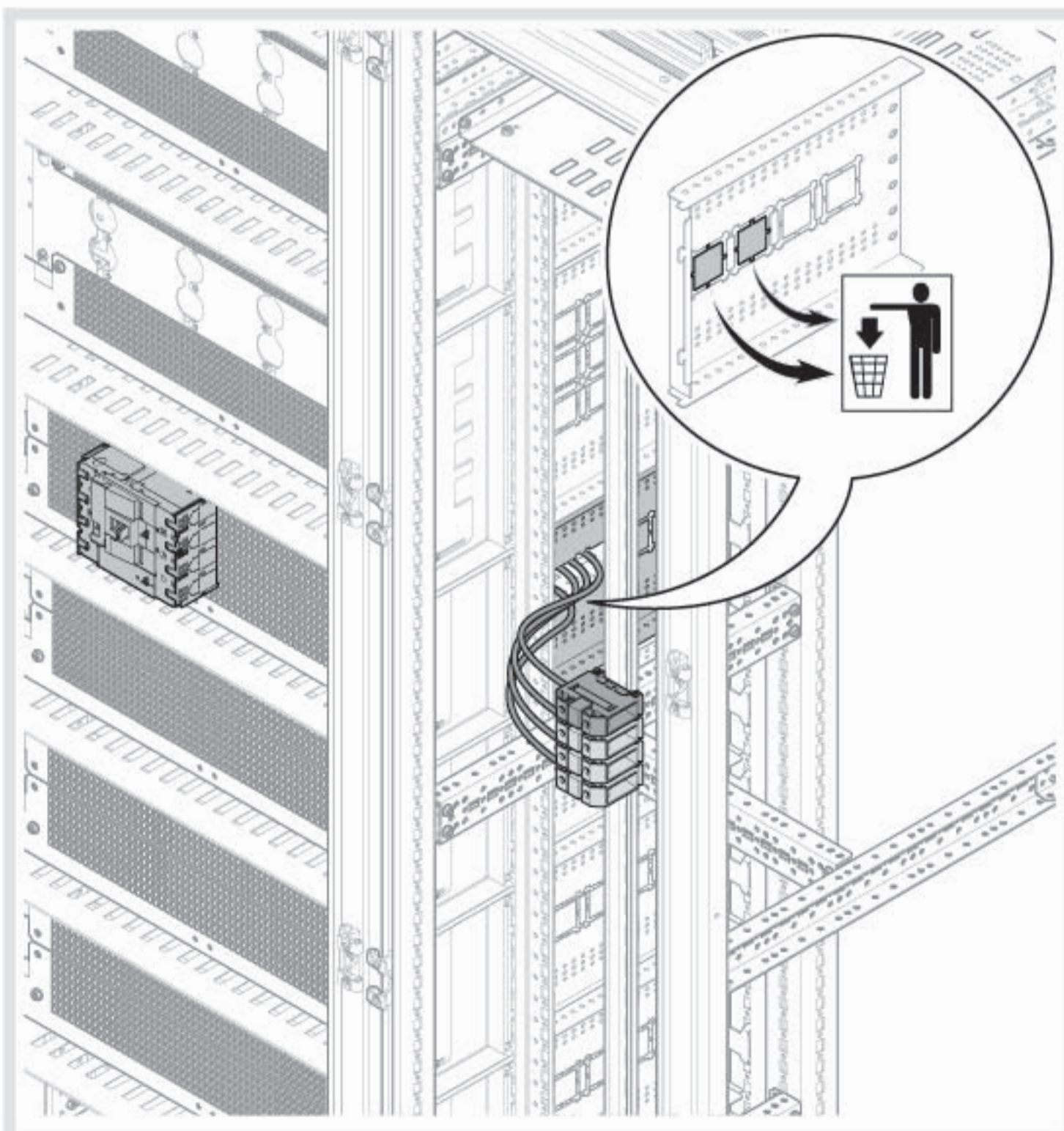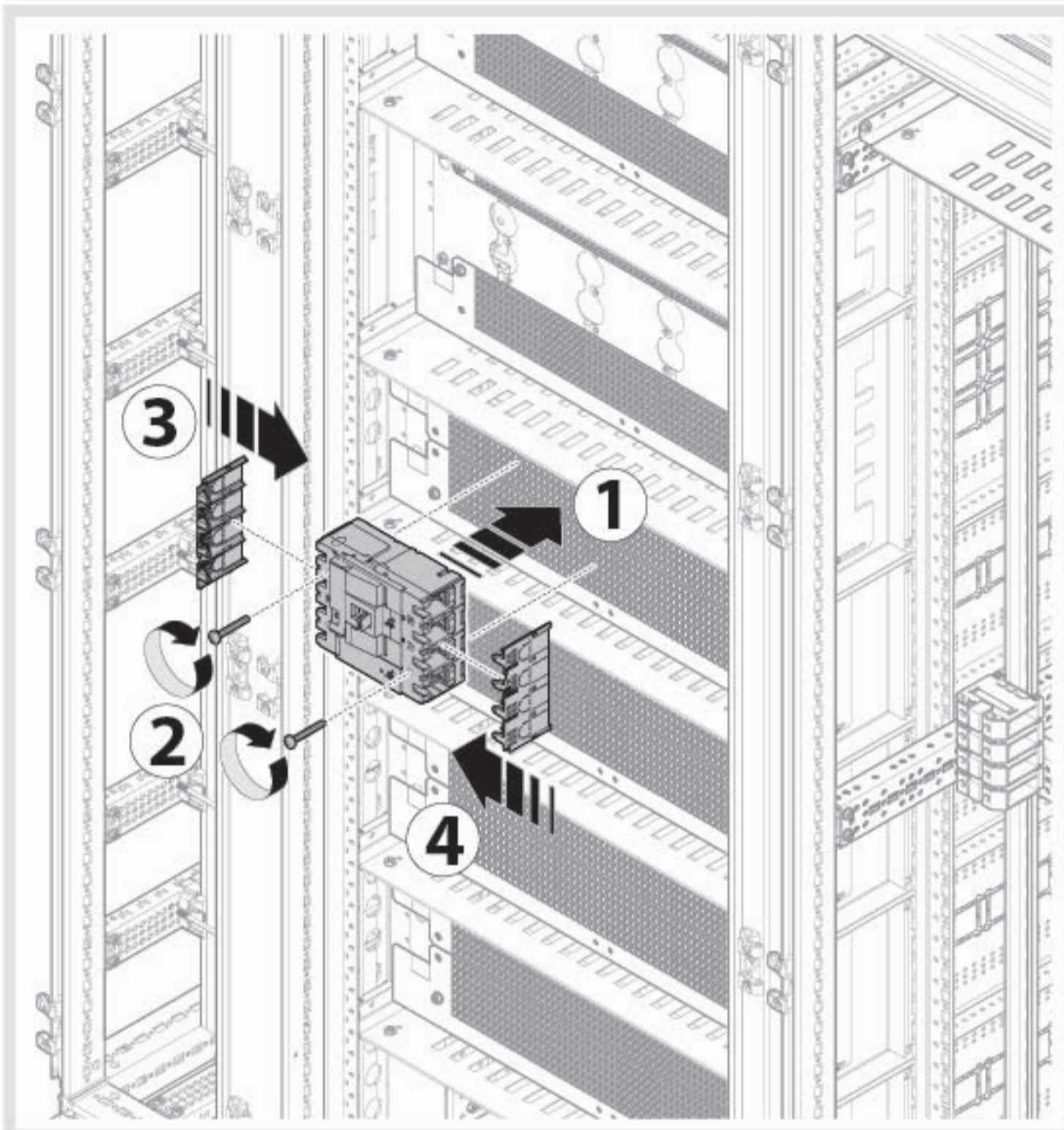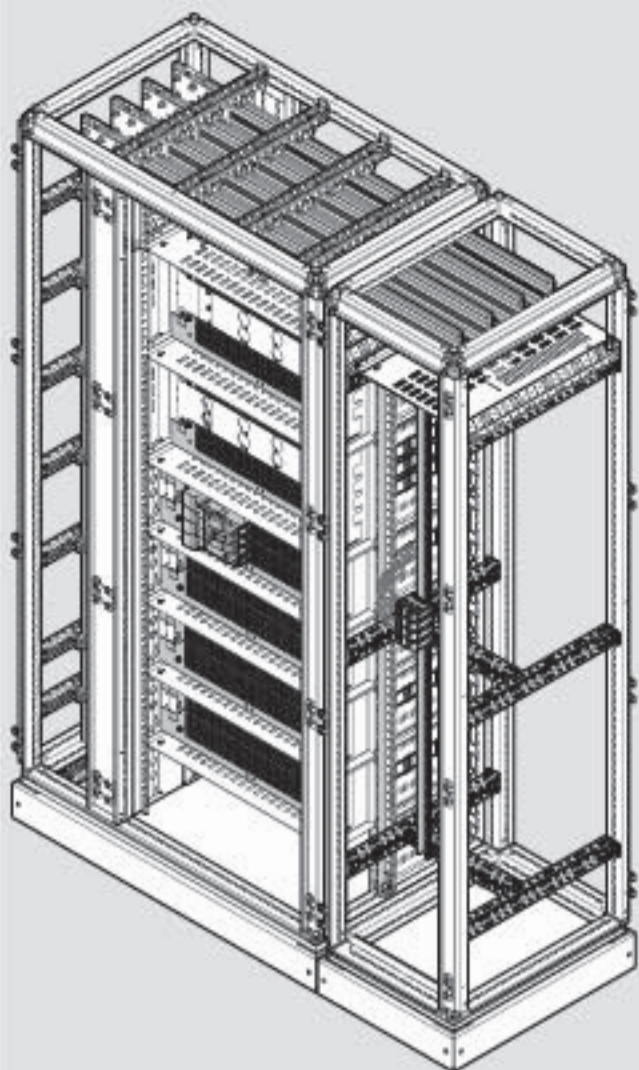



3b 4b

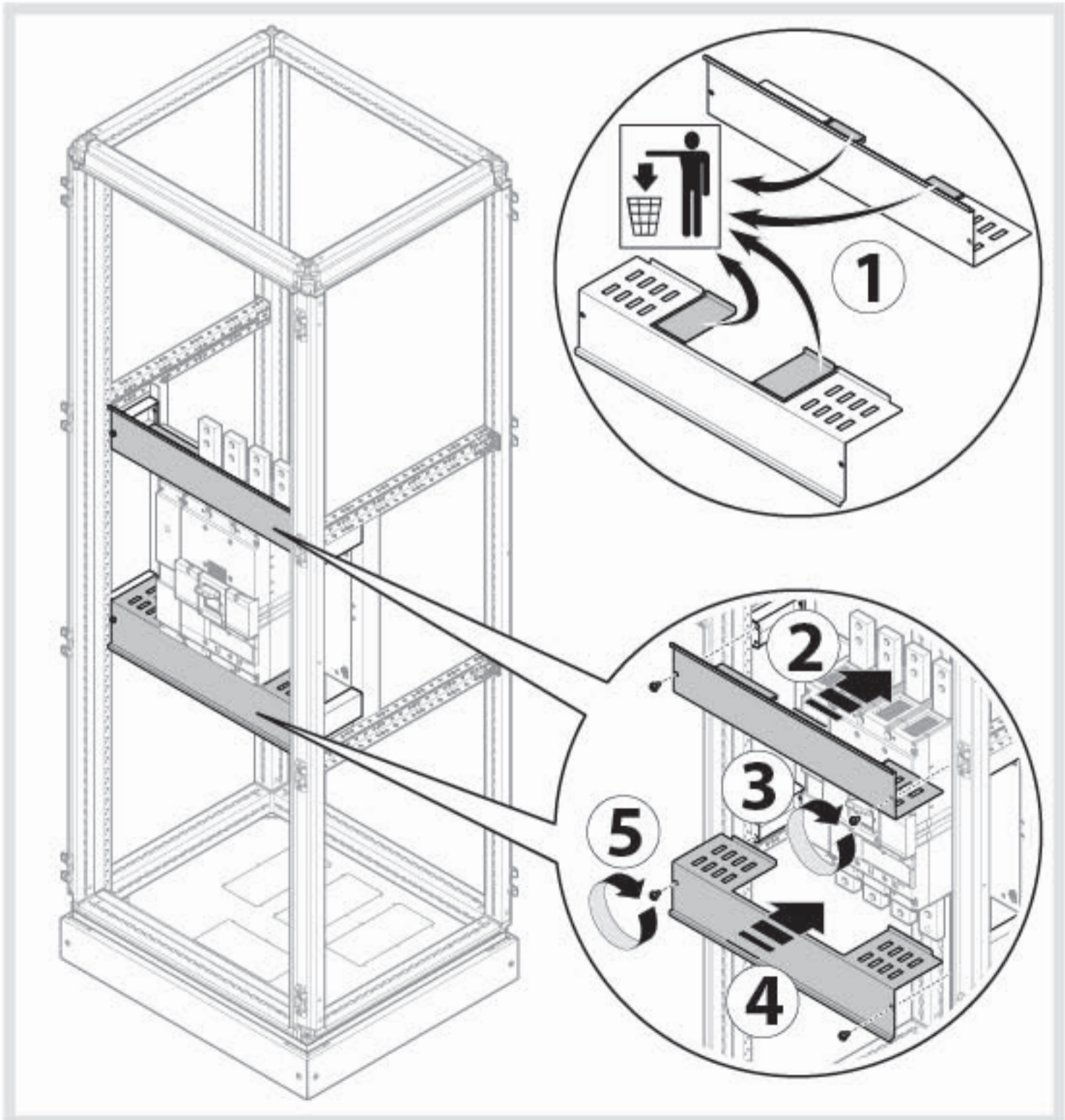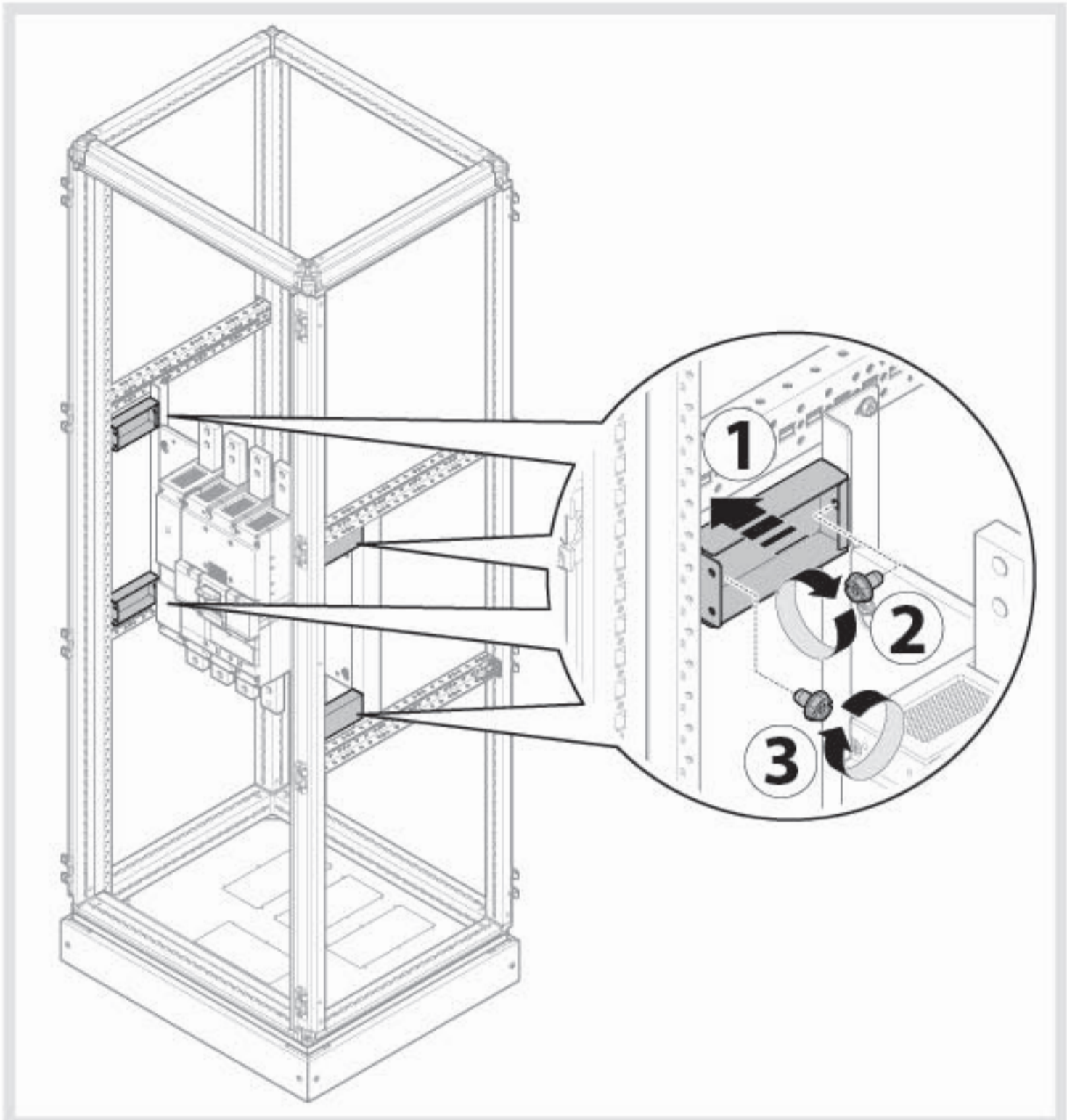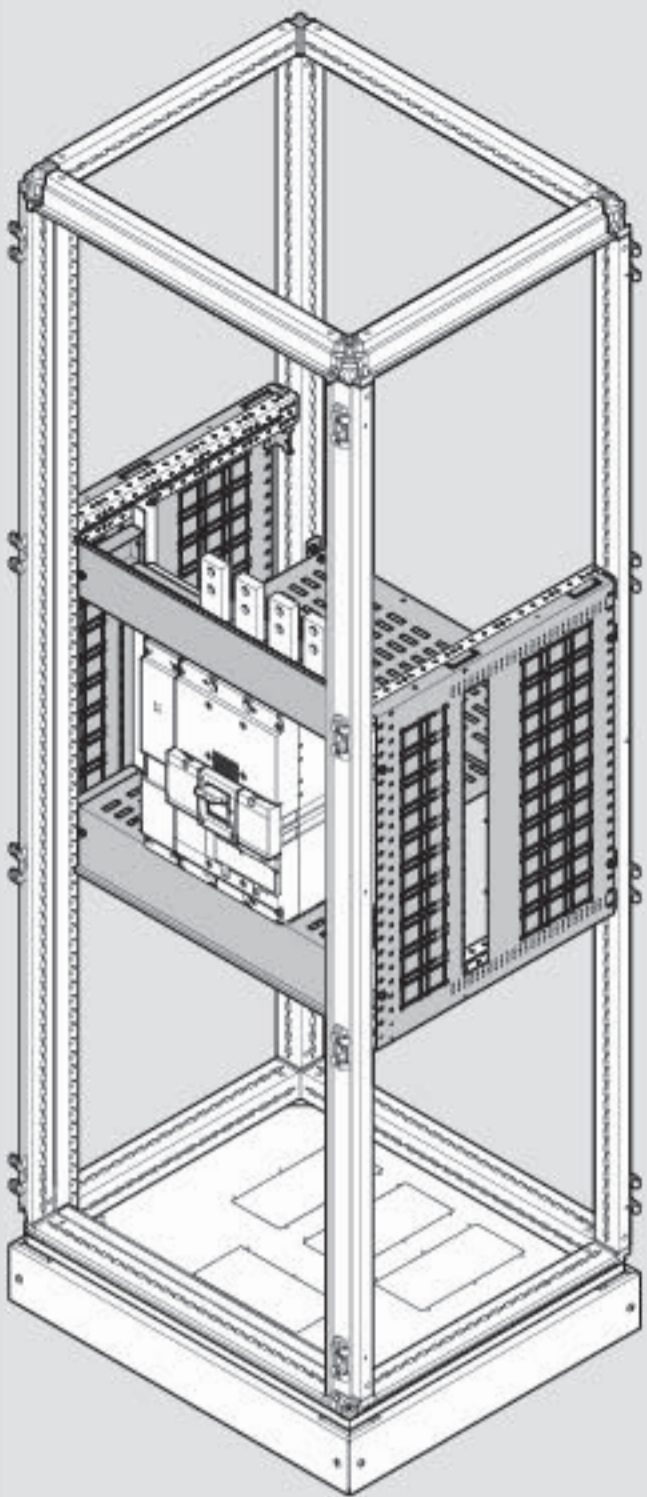




	Up to
UC1000V	1000A
UC1600V	1600A

3b 4b

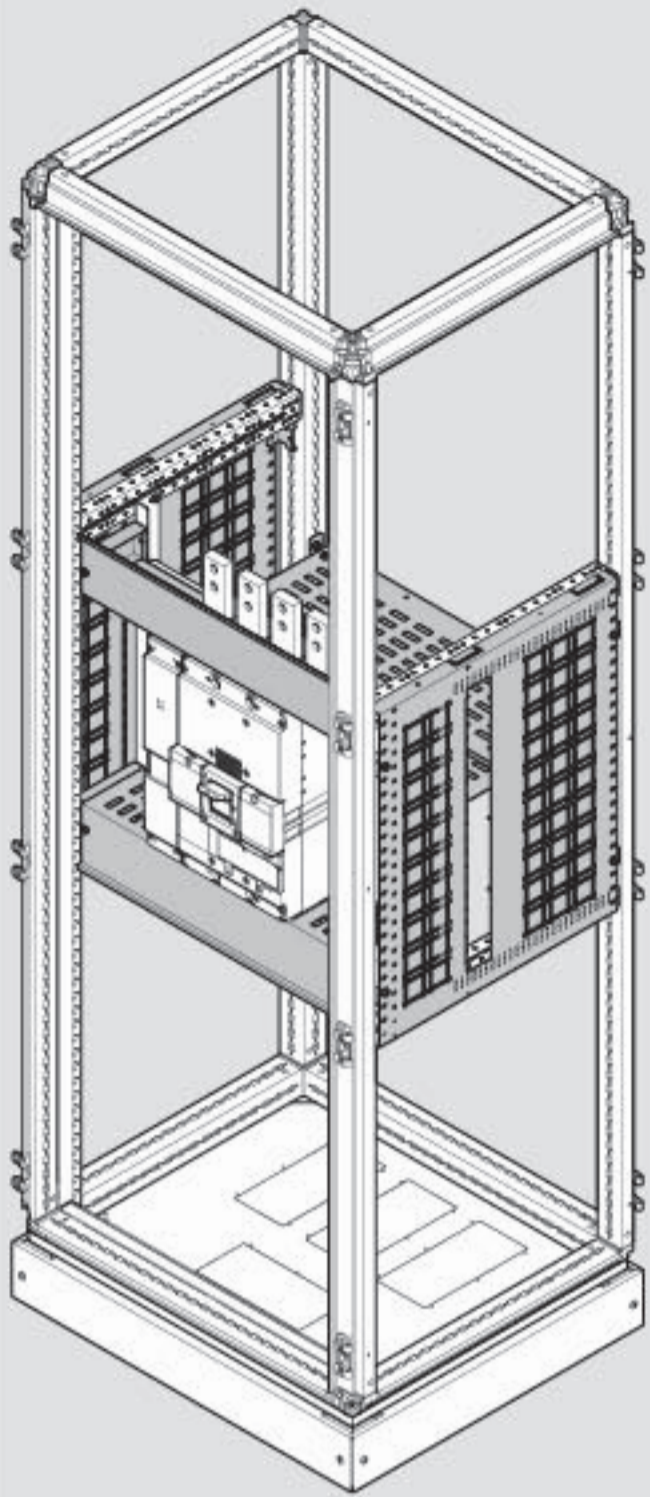


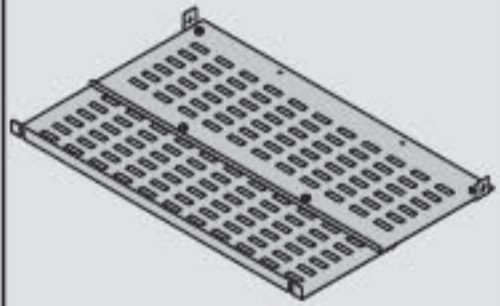	Up to
UC1000BH UC1600BH	1000A 1600A

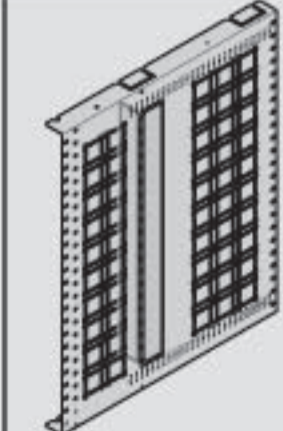	D	Up to
UC4060FUL UC6060FUL UC8060FUL	400 600 800	1600A

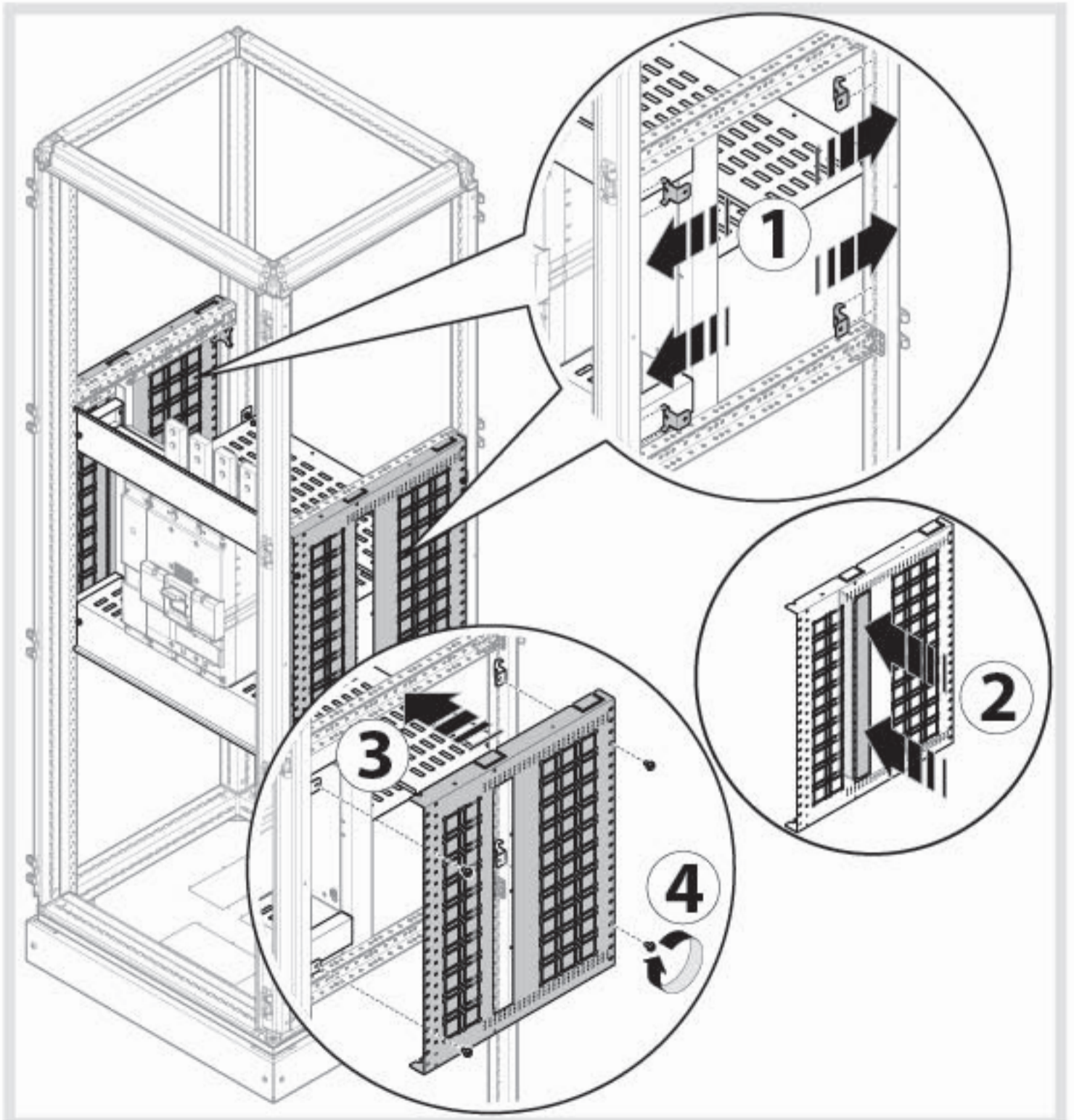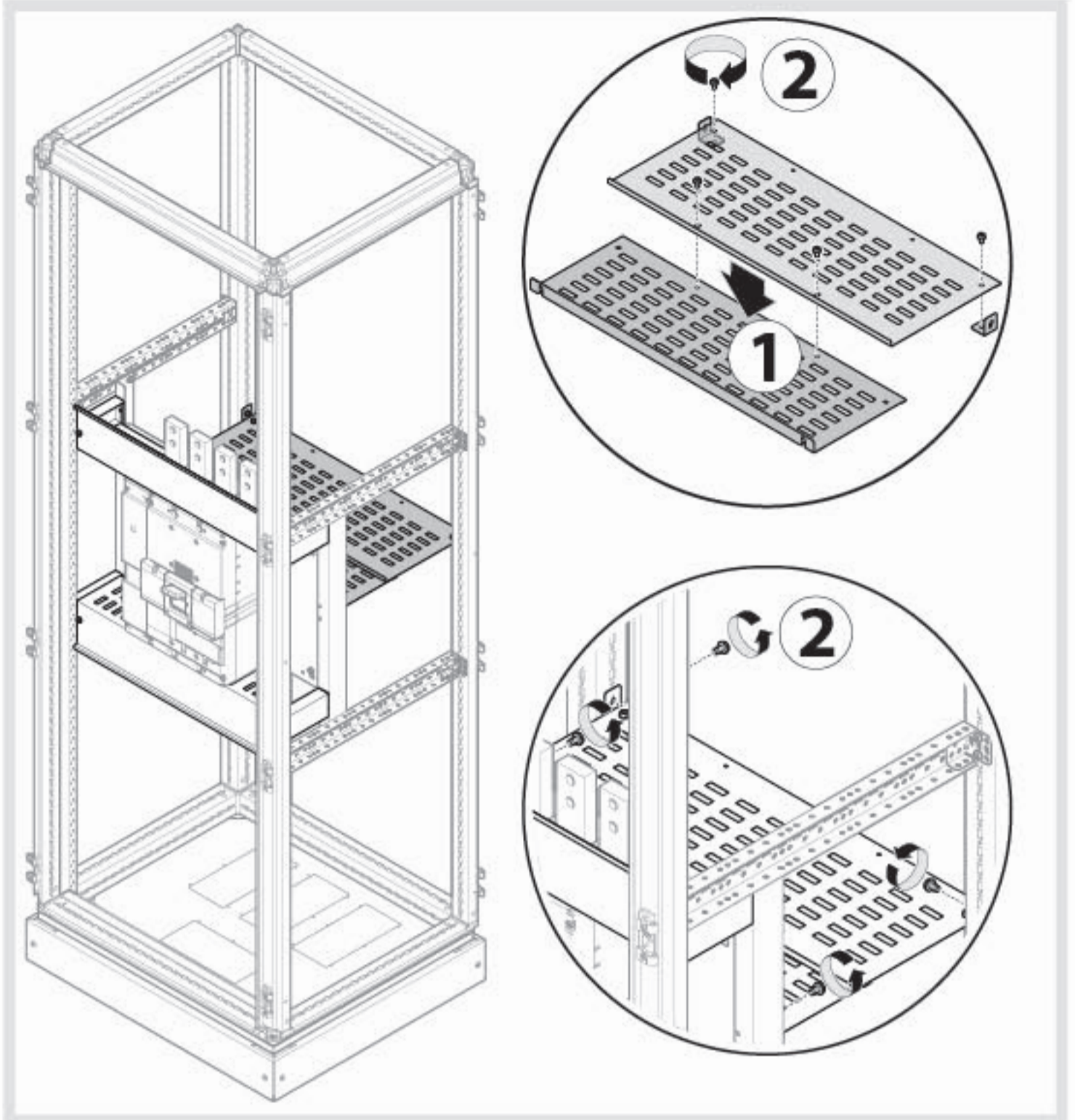



3b 4b


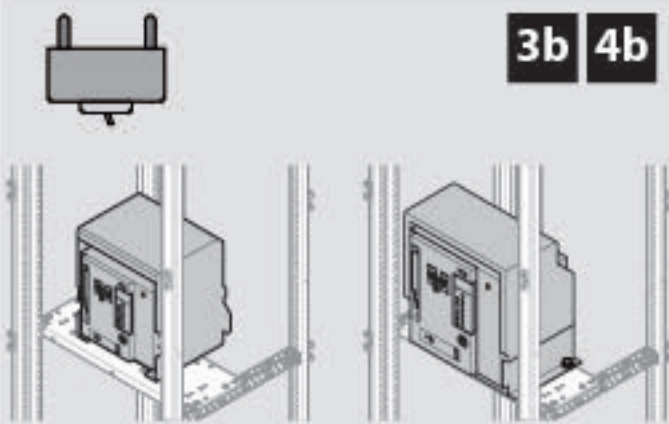


DRAW-OUT

FIX






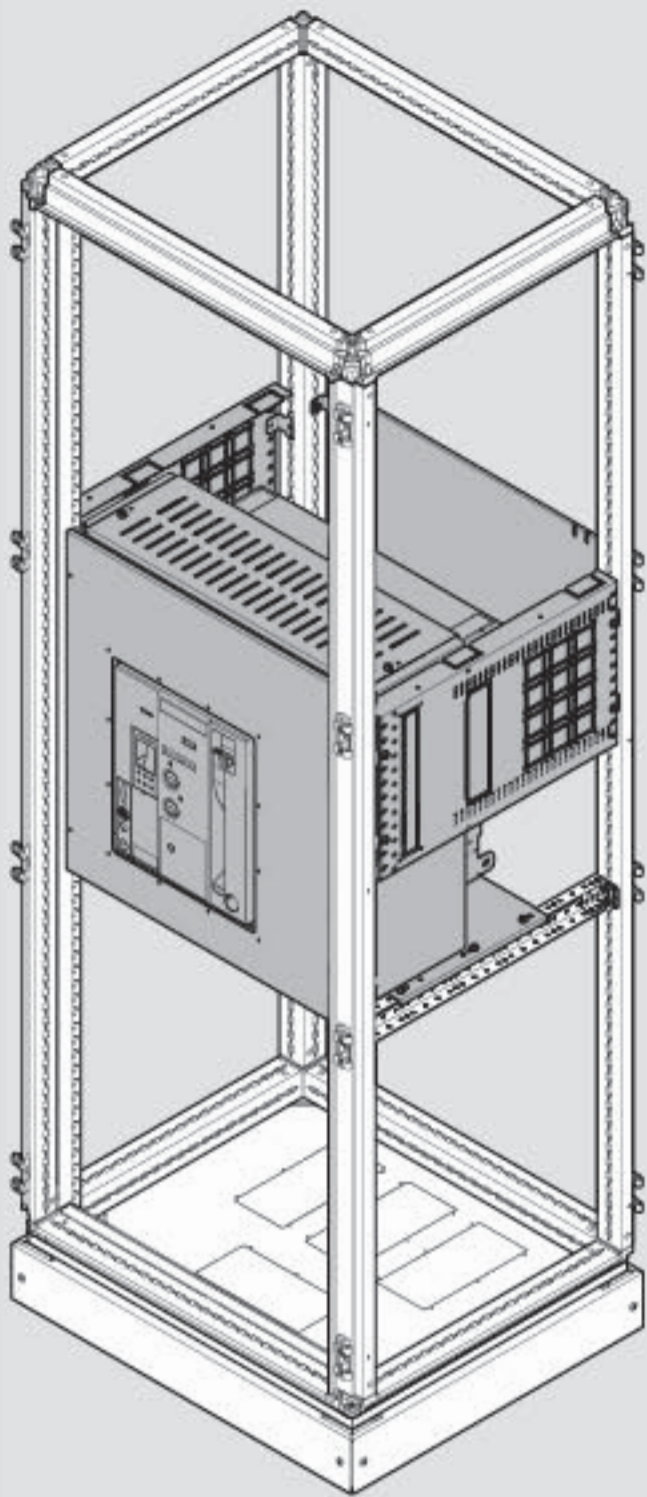


	ACB	W	H	D	Up to In
UC6060HWT	HWT	600	600	600	2000A
UC6080HWT	HWT	800	600	800	2000A
UC608040HWT	HWT	800	600	800	4000A
UC6060HW	HW	600	600	600	2000A
UC6080HW	HW	800	600	800	4000A

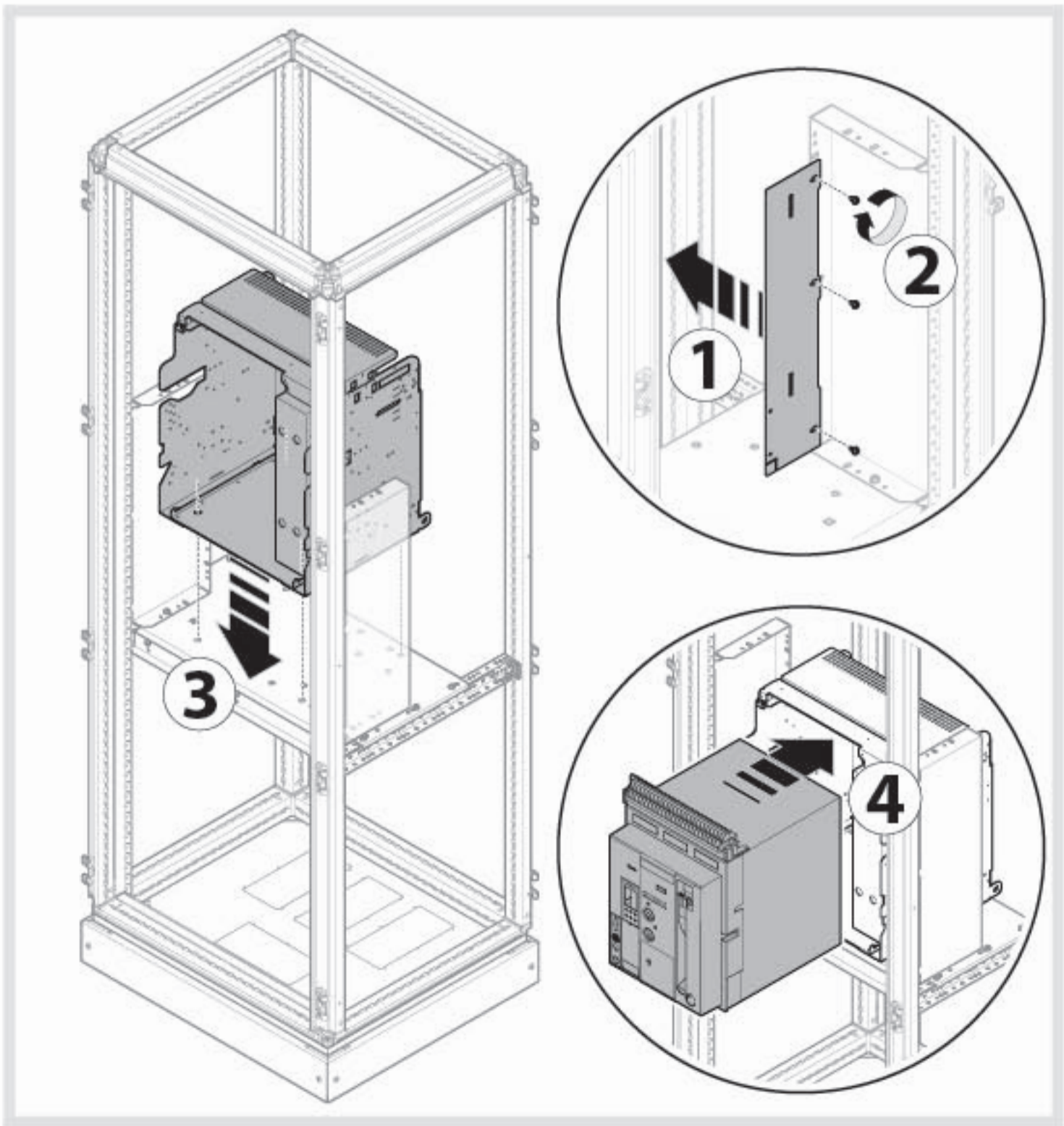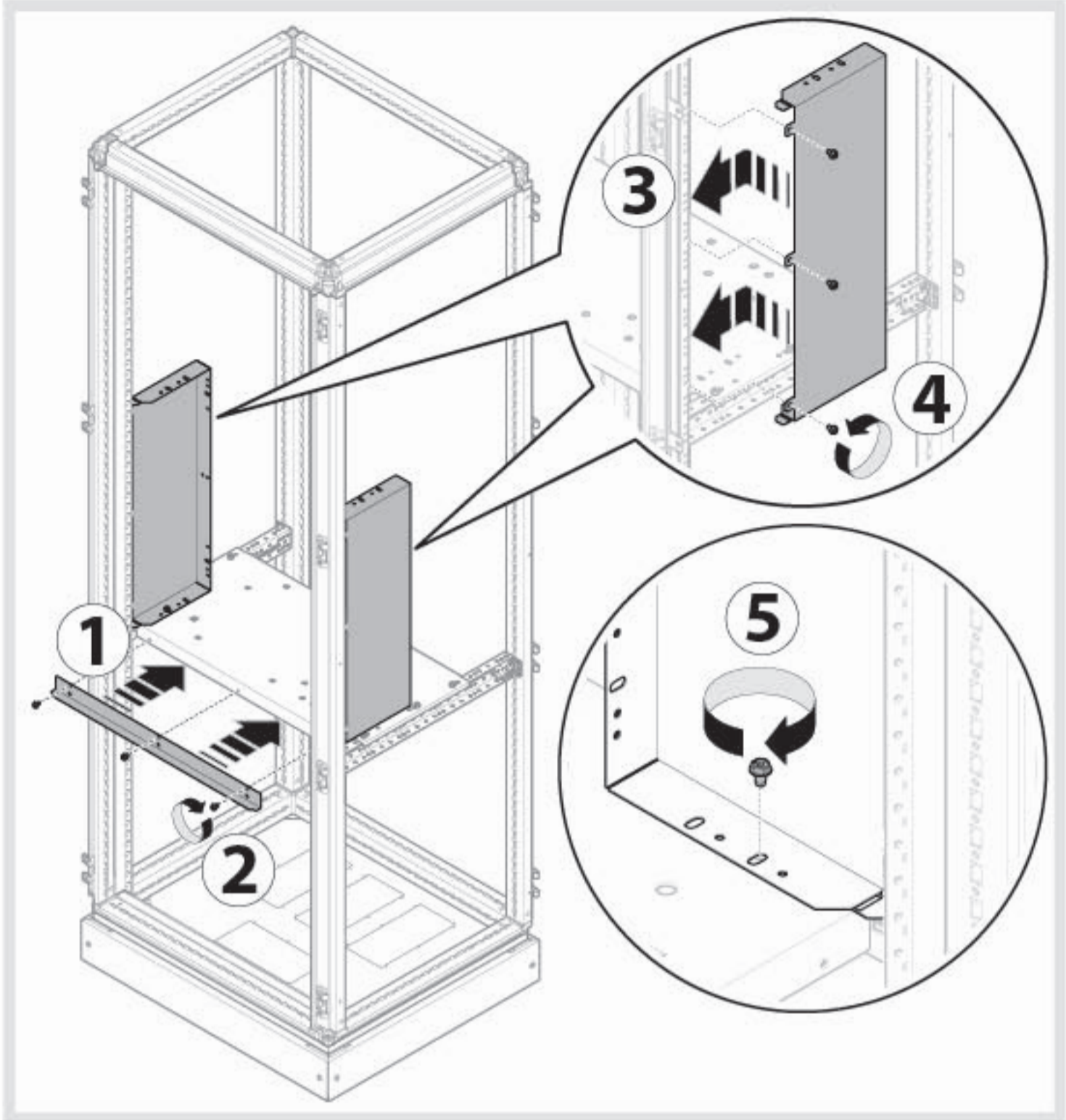










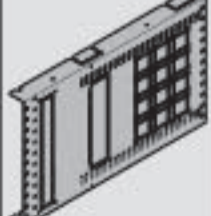
3b 4b

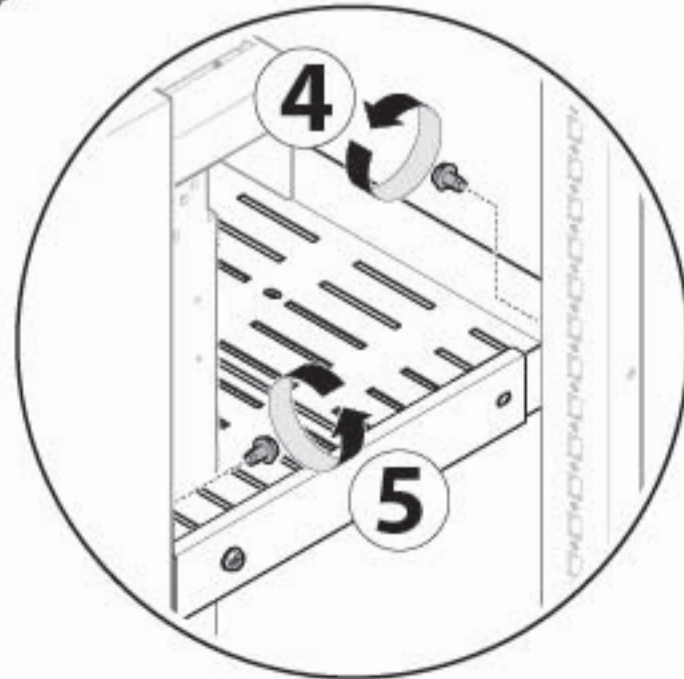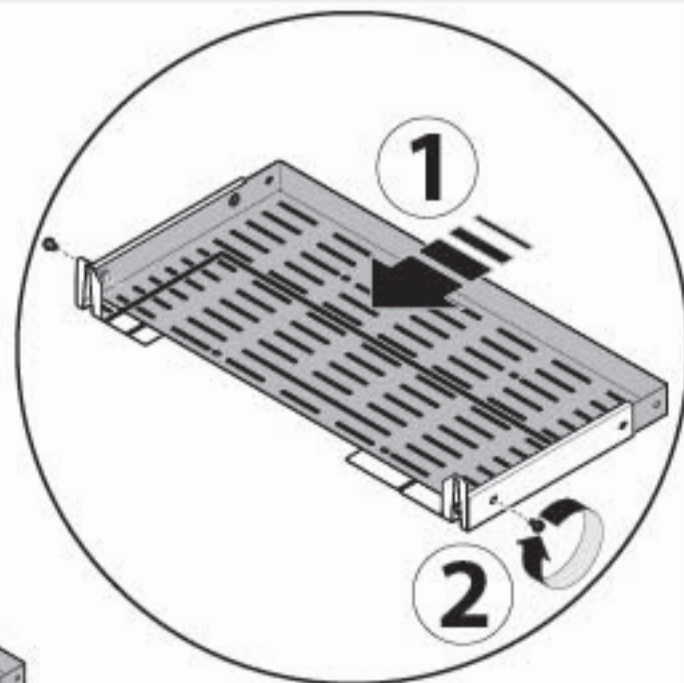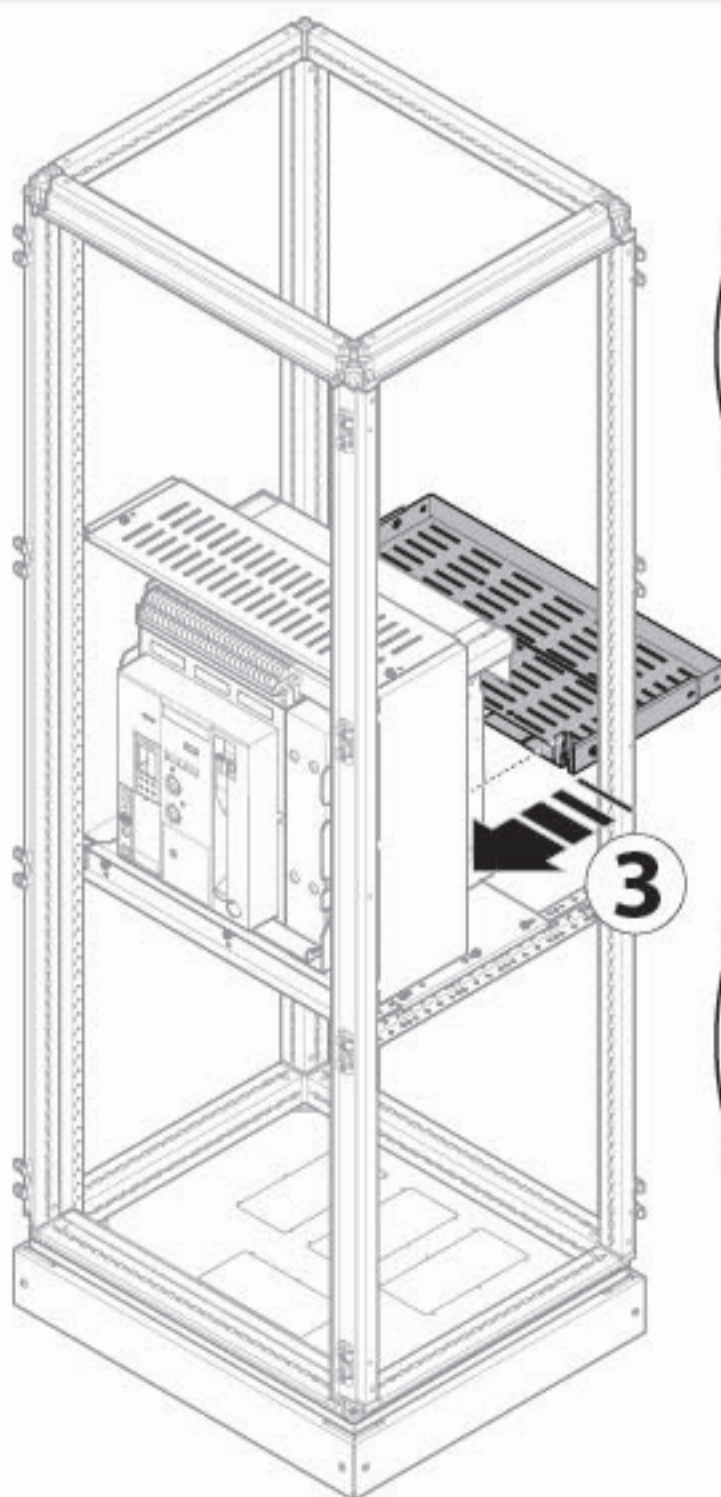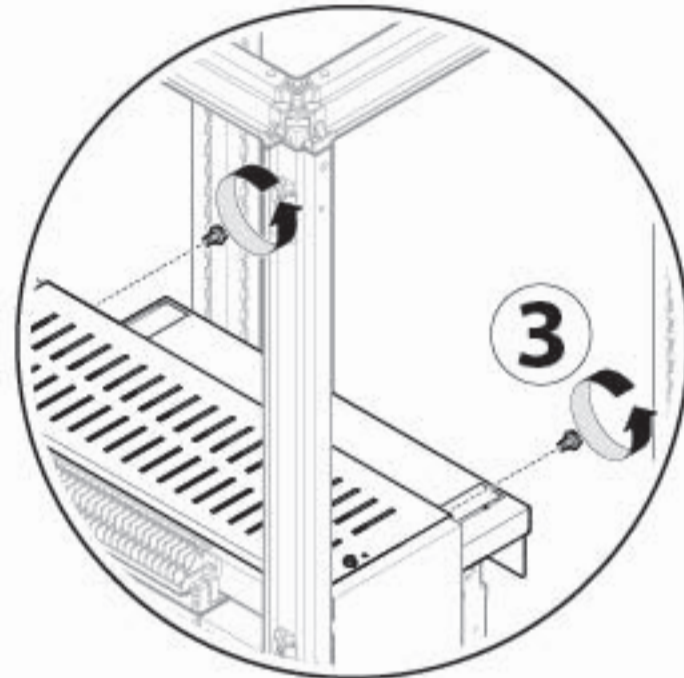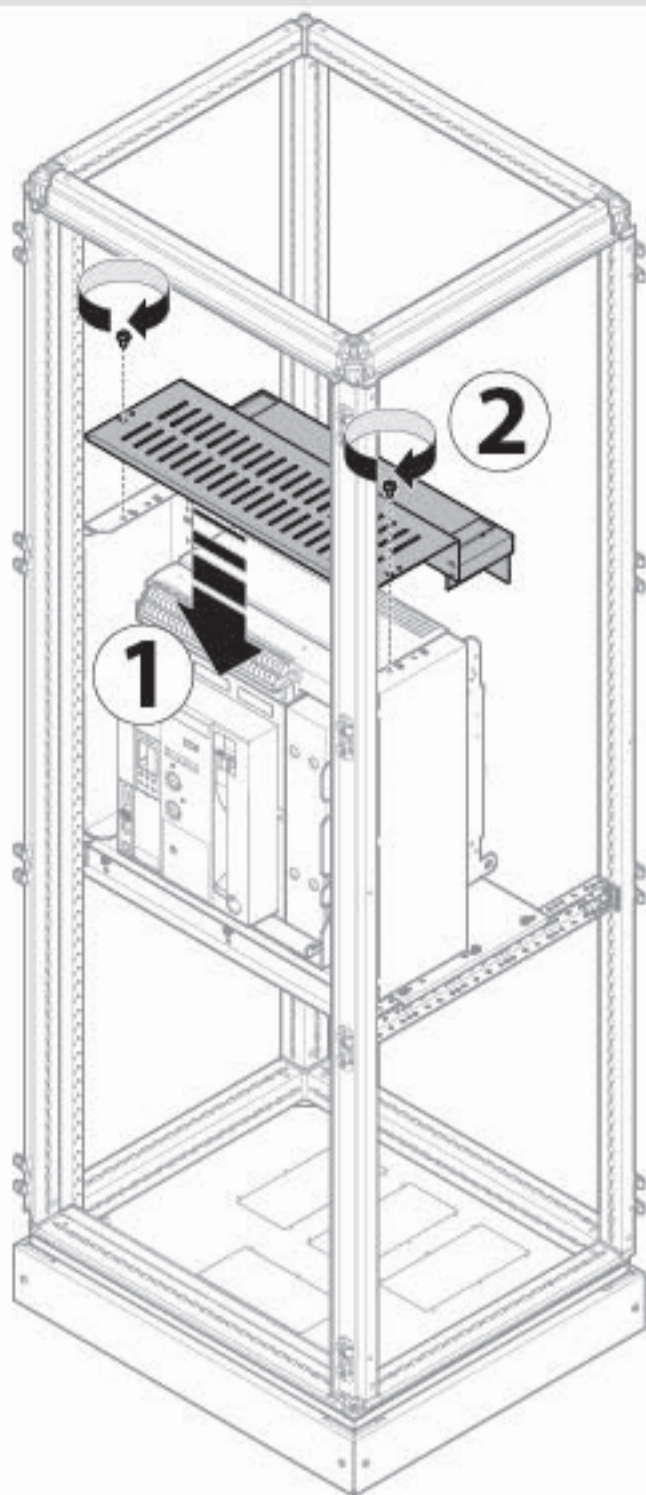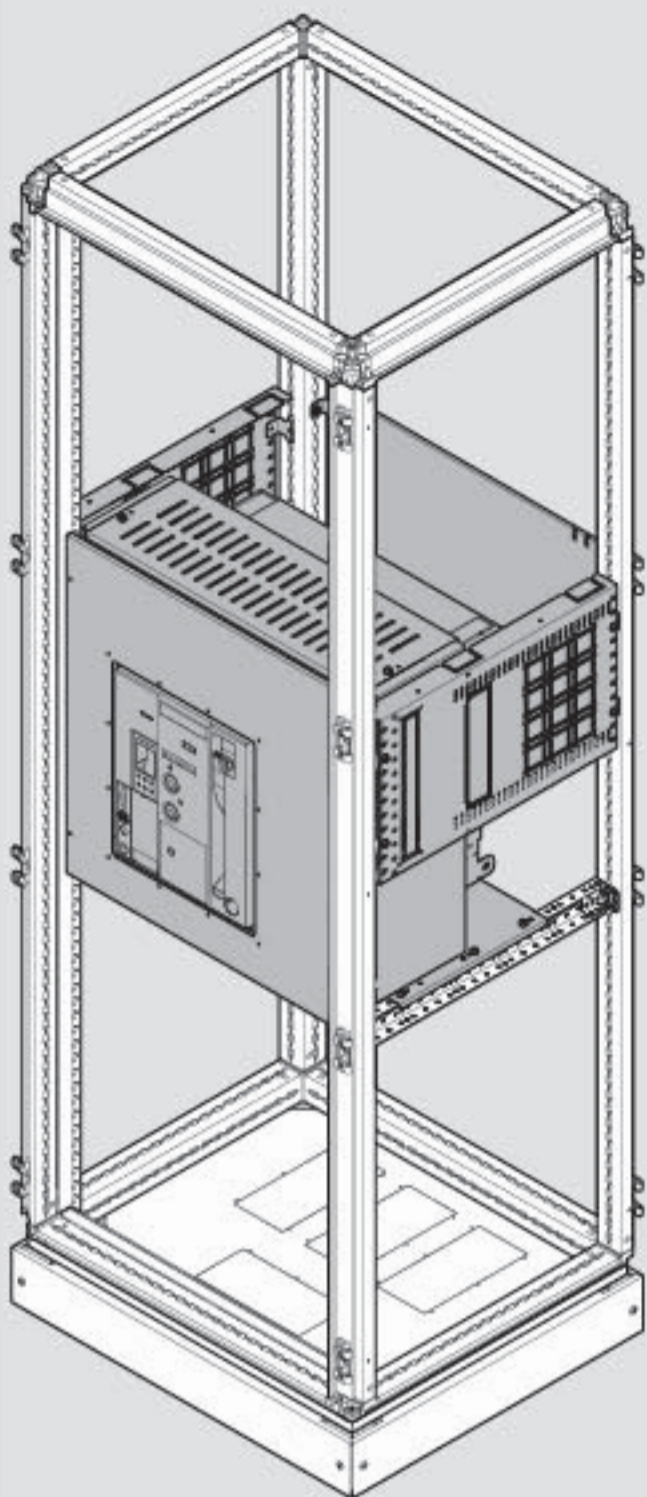






3b 4b

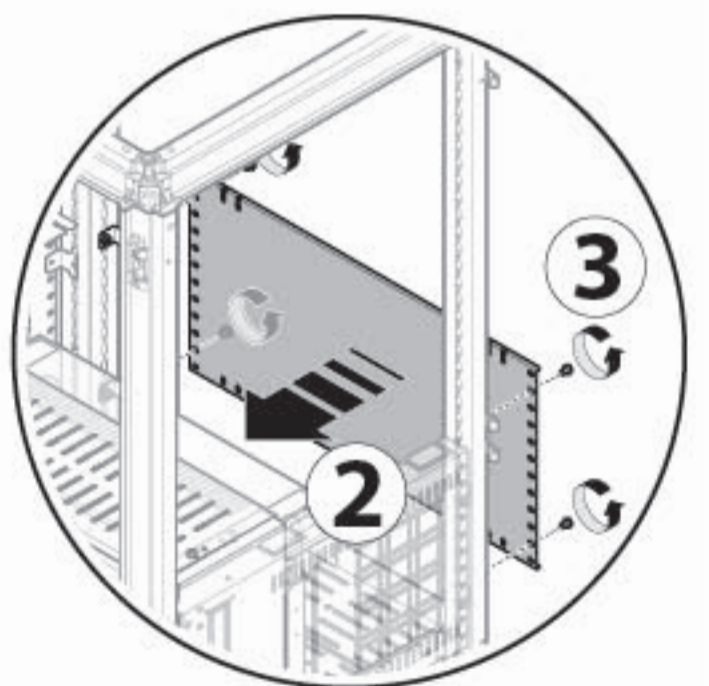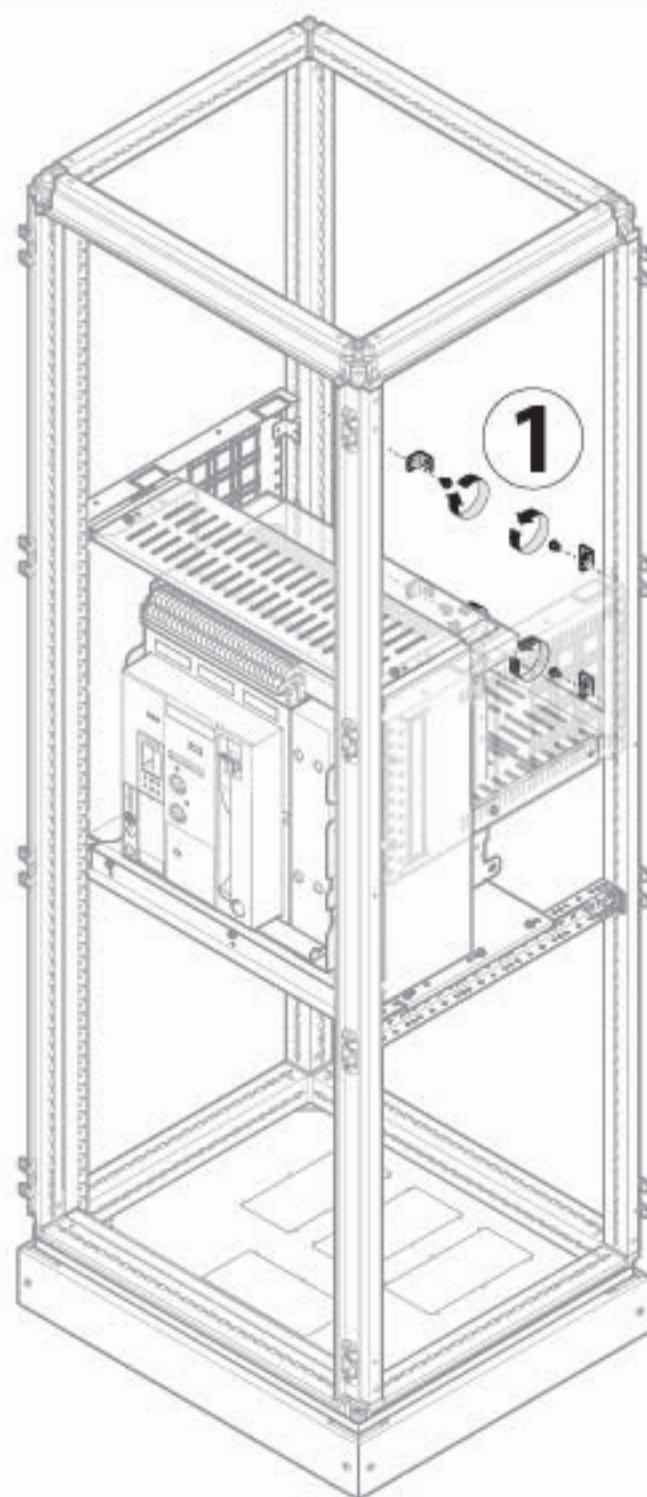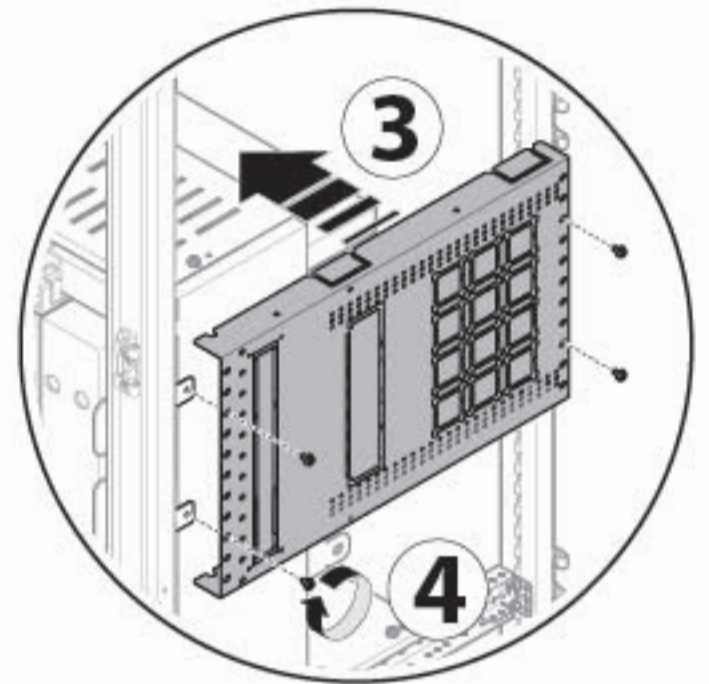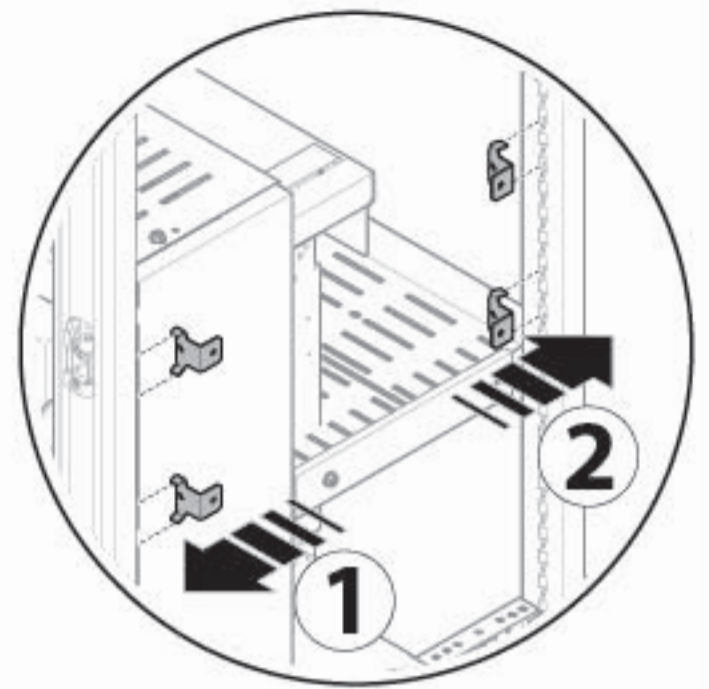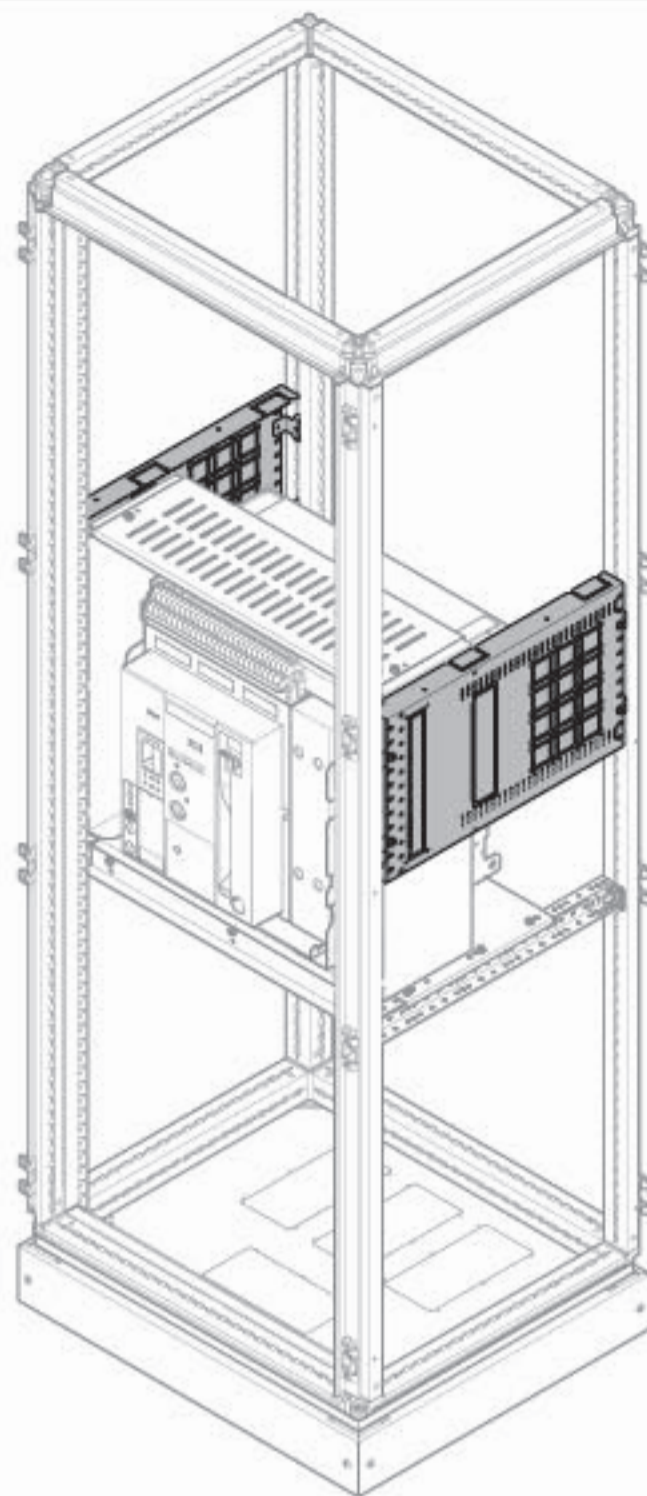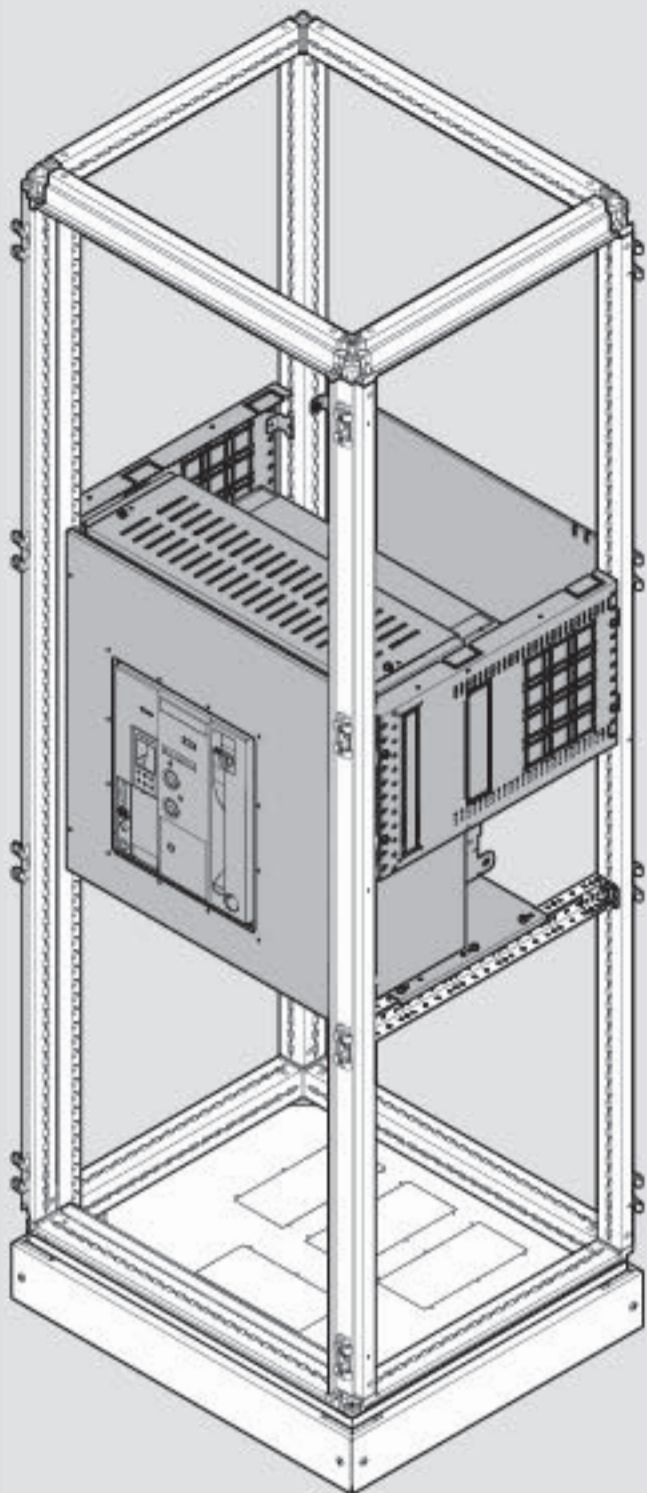



	ACB	D	
UC6060HWT	HWT	600	UC3060FUL
UC6080HWT	HWT	600	UC3060FUL
		800	UC3080FUL
UC608040HWT	HWT	800	UC3080FUL
UC6060HW	HW	600	UC3060FUL
UC6080HW	HW	800	UC3080FUL







3b 4b

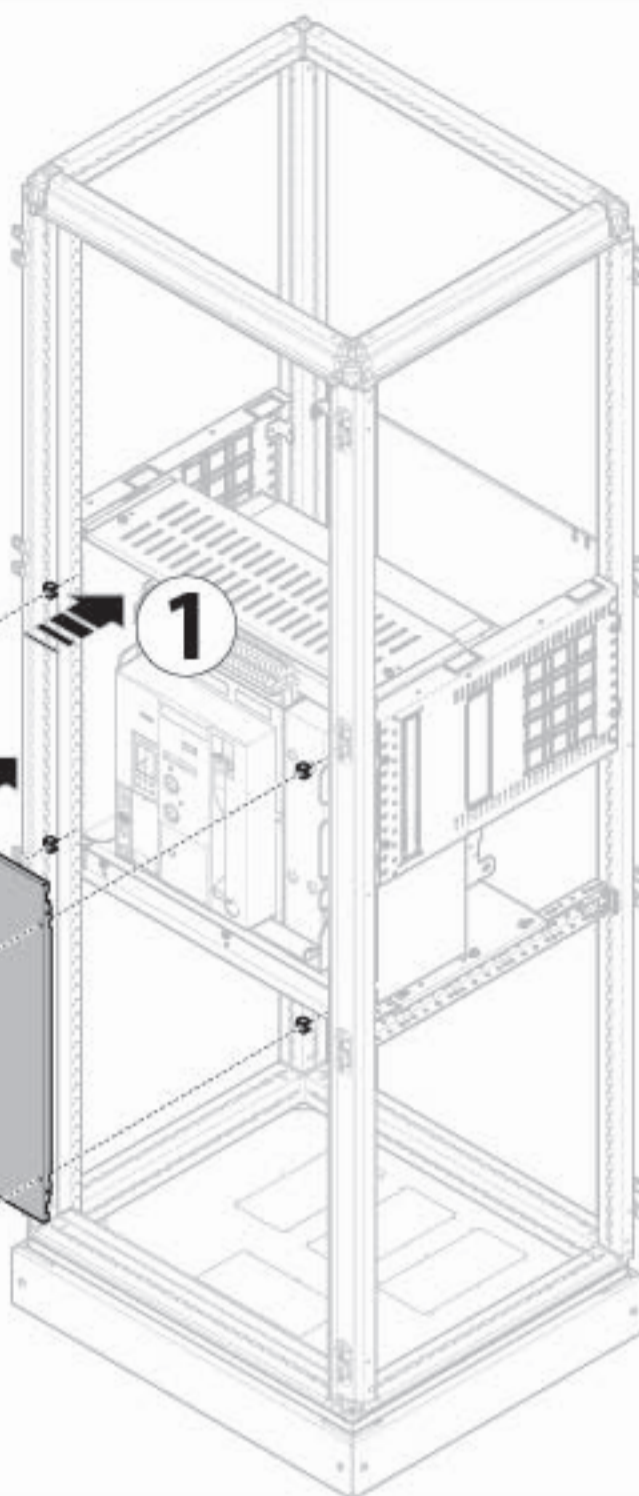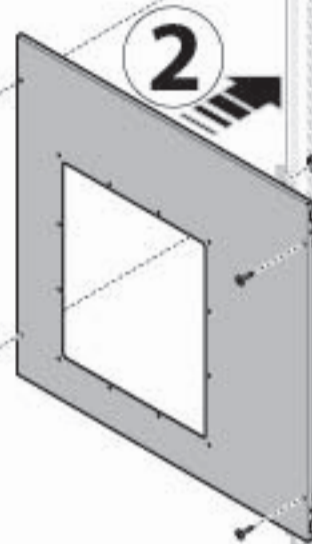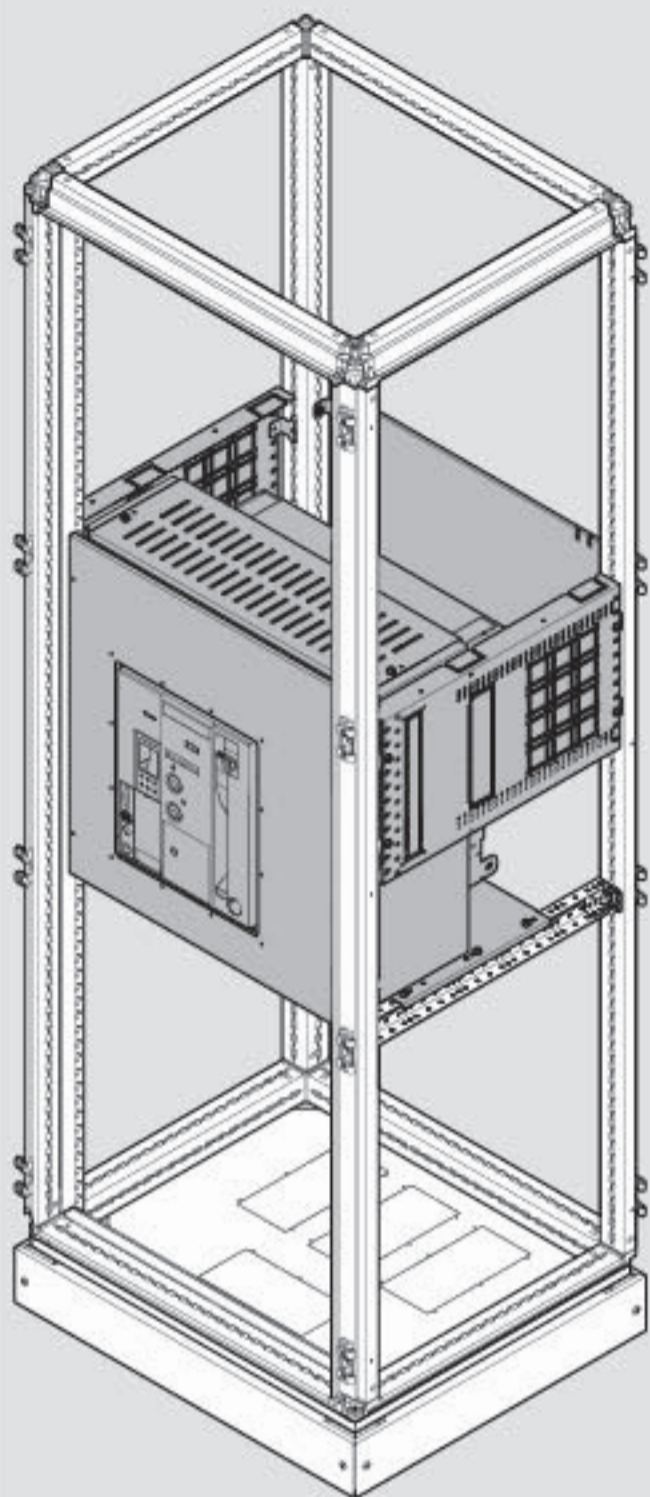


3b

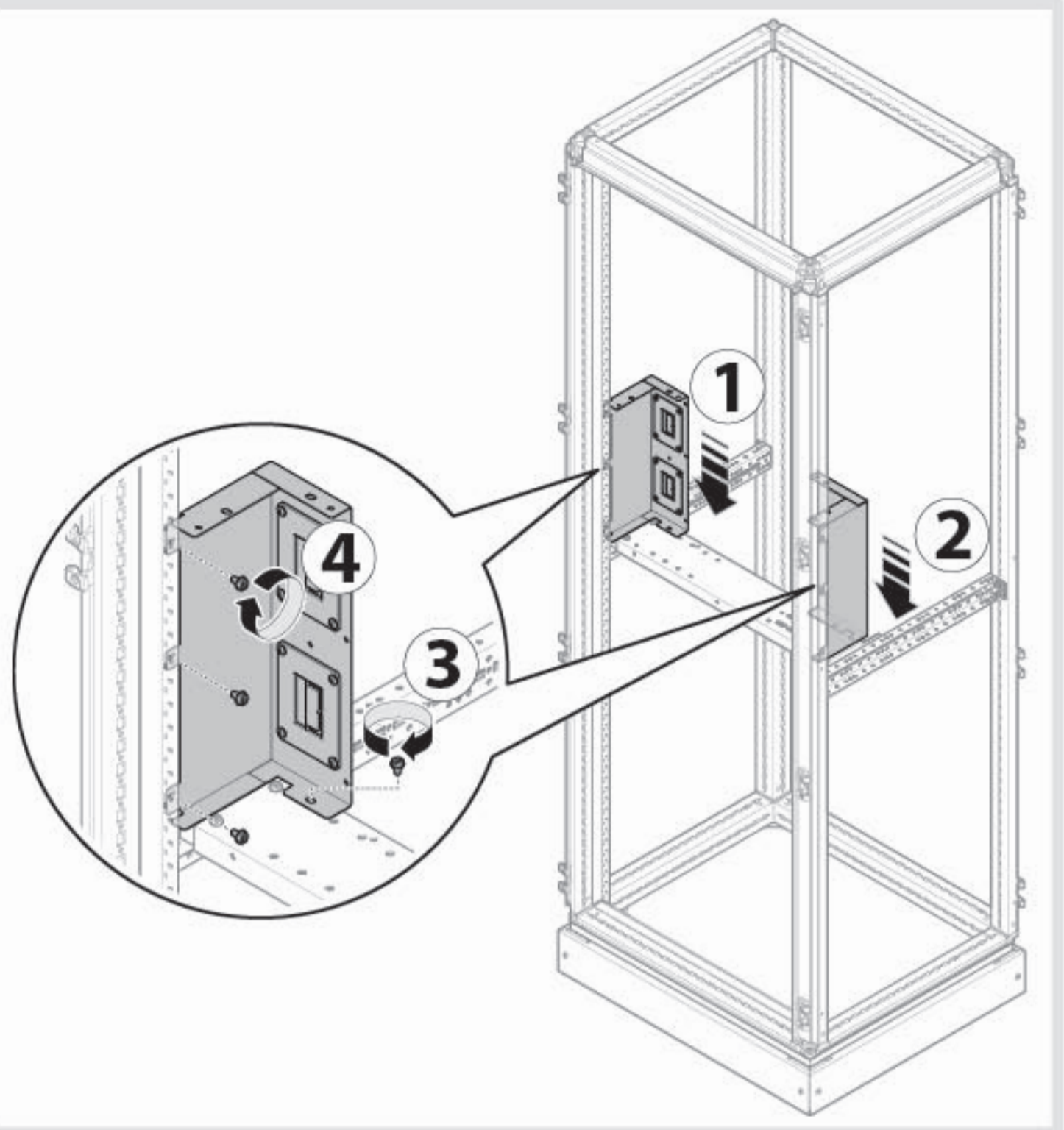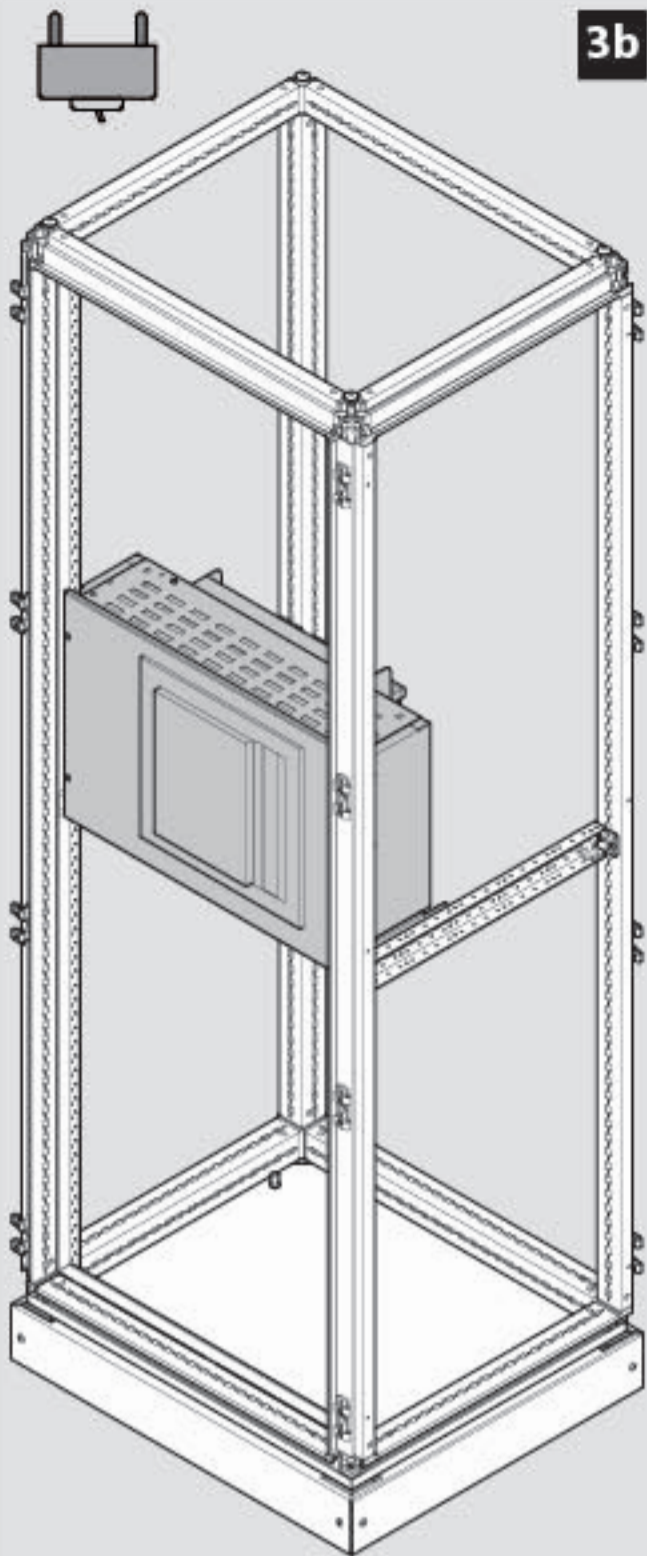

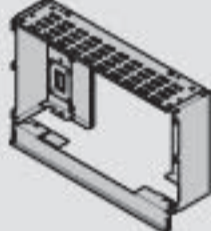	Device 3/4 Poles	W	Type	Form
	HW1			
UC6040FW1	1600A	600	FIX	3b
UC8040FW1	1600A	800		

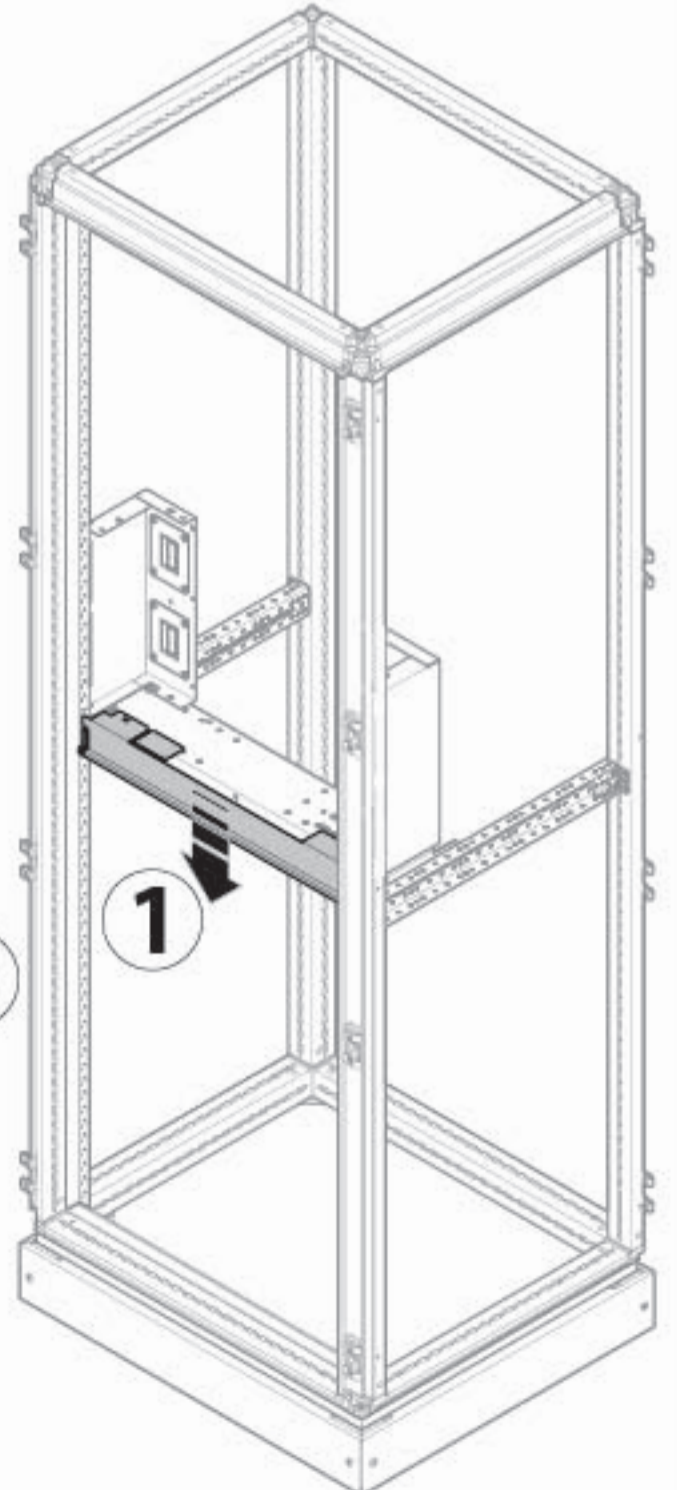
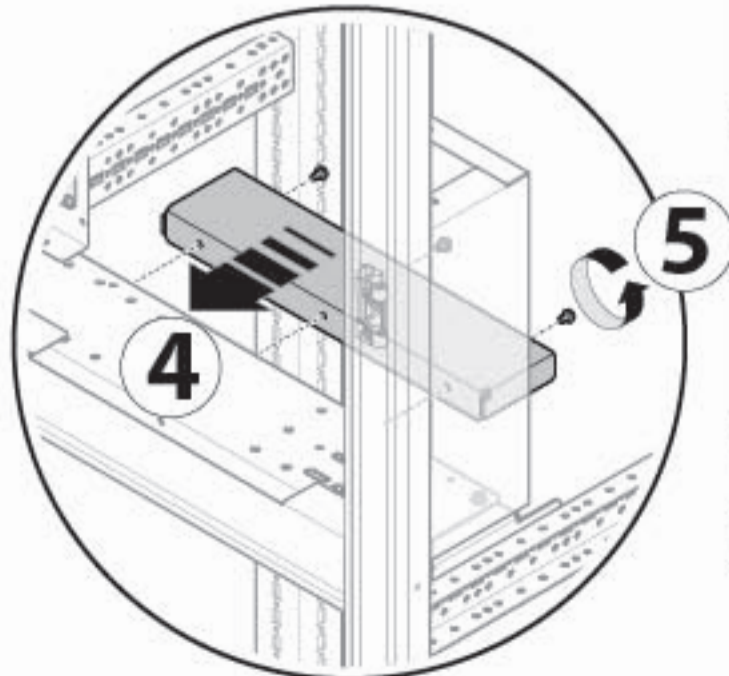
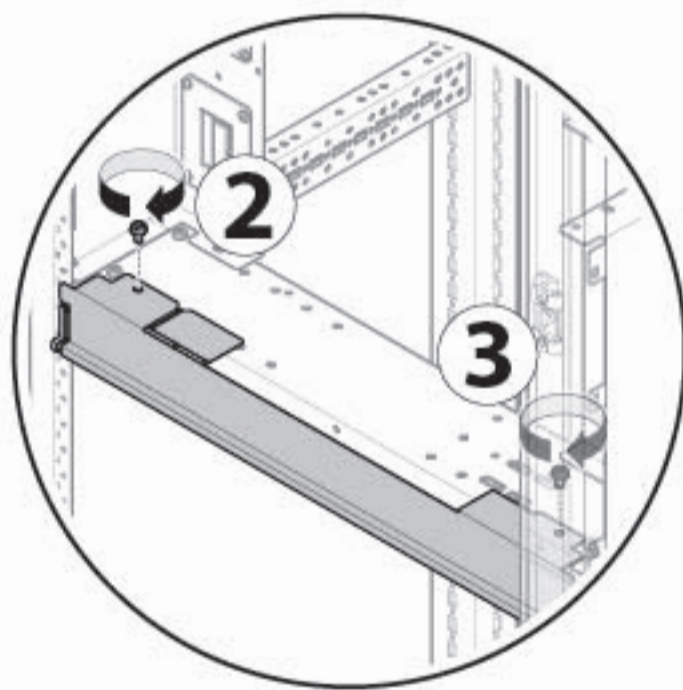


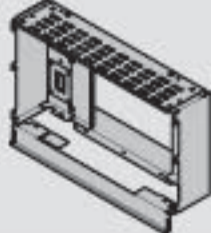	Device 3/4 Poles	W	Type	Form
	HW1			
UC6040DHW1	1600A	600	D/W	3b
UC8040DHW1	1600A	800		

4 / 5 only for D/W






3b

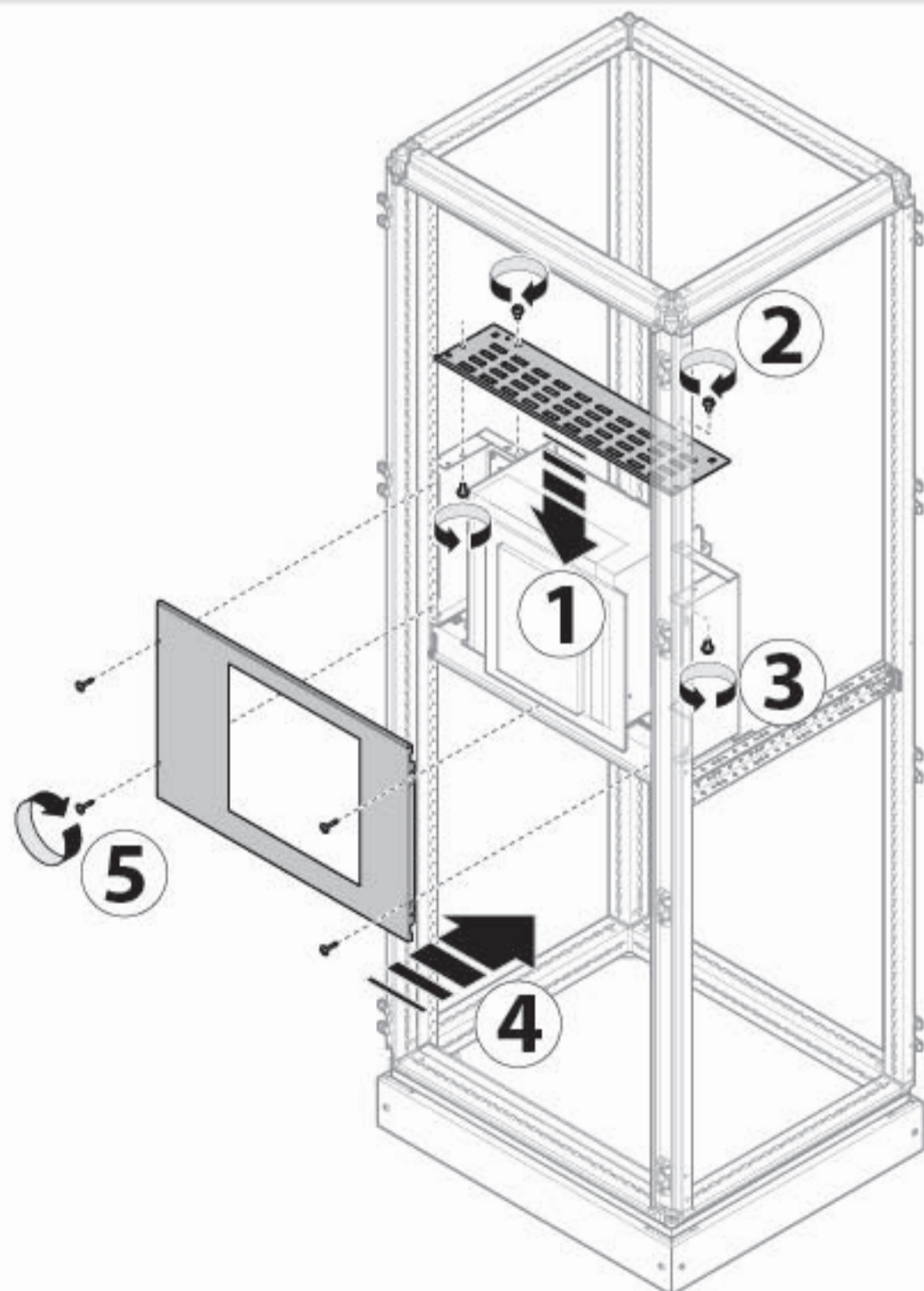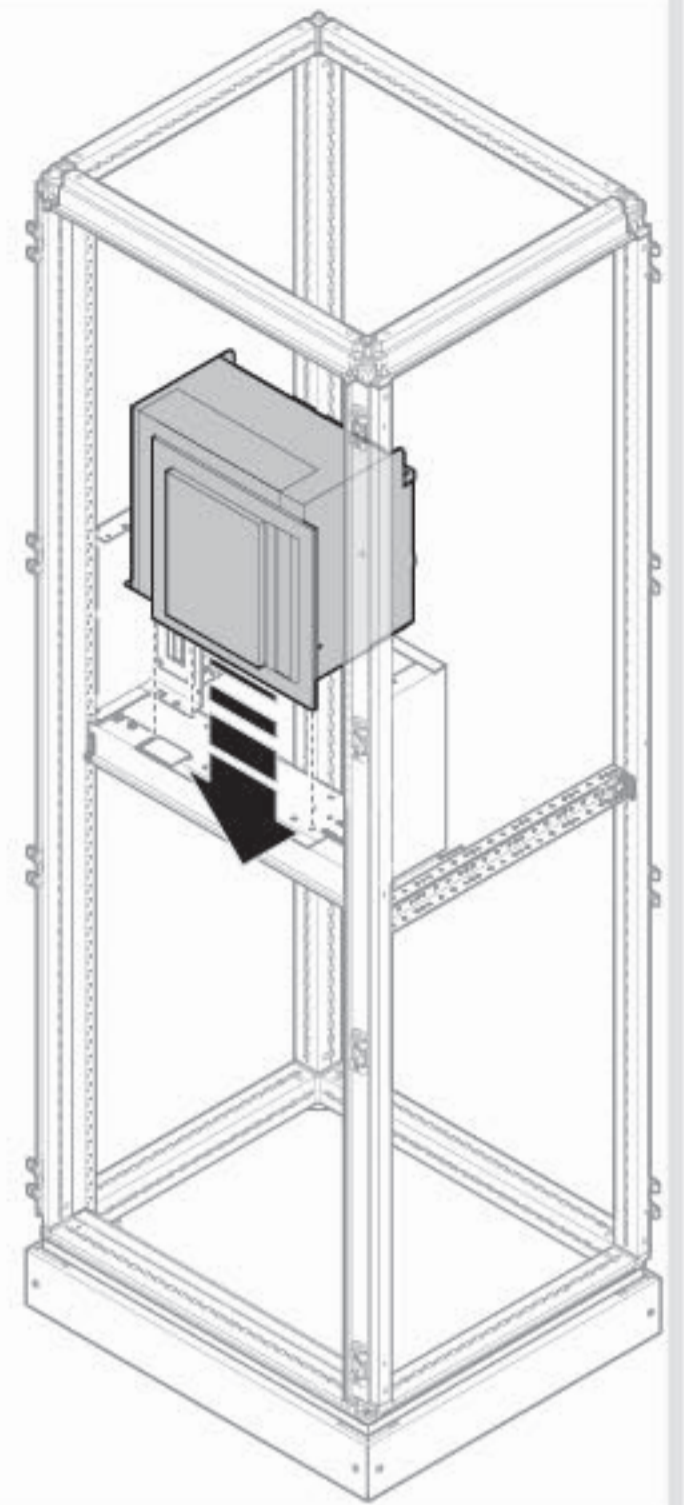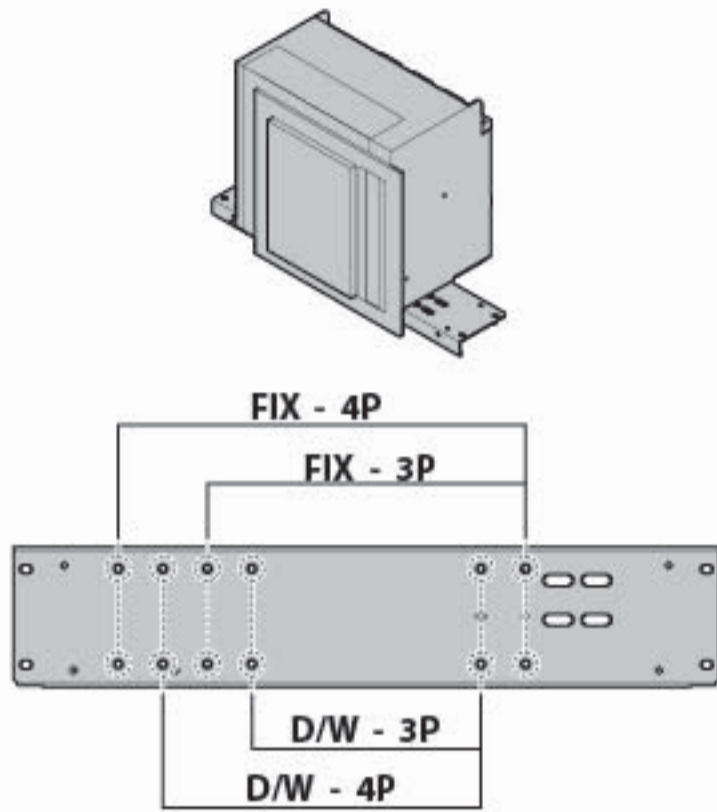





4b

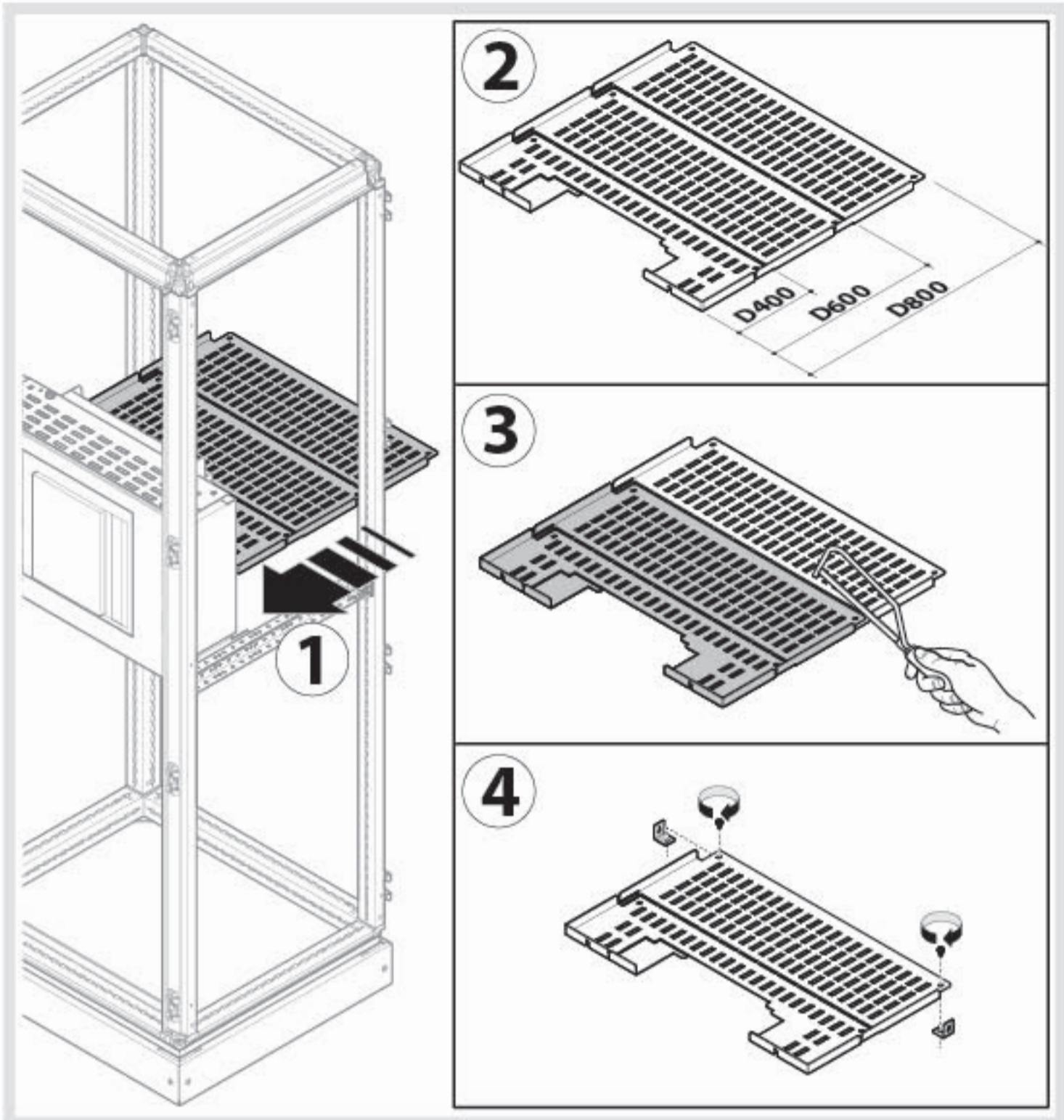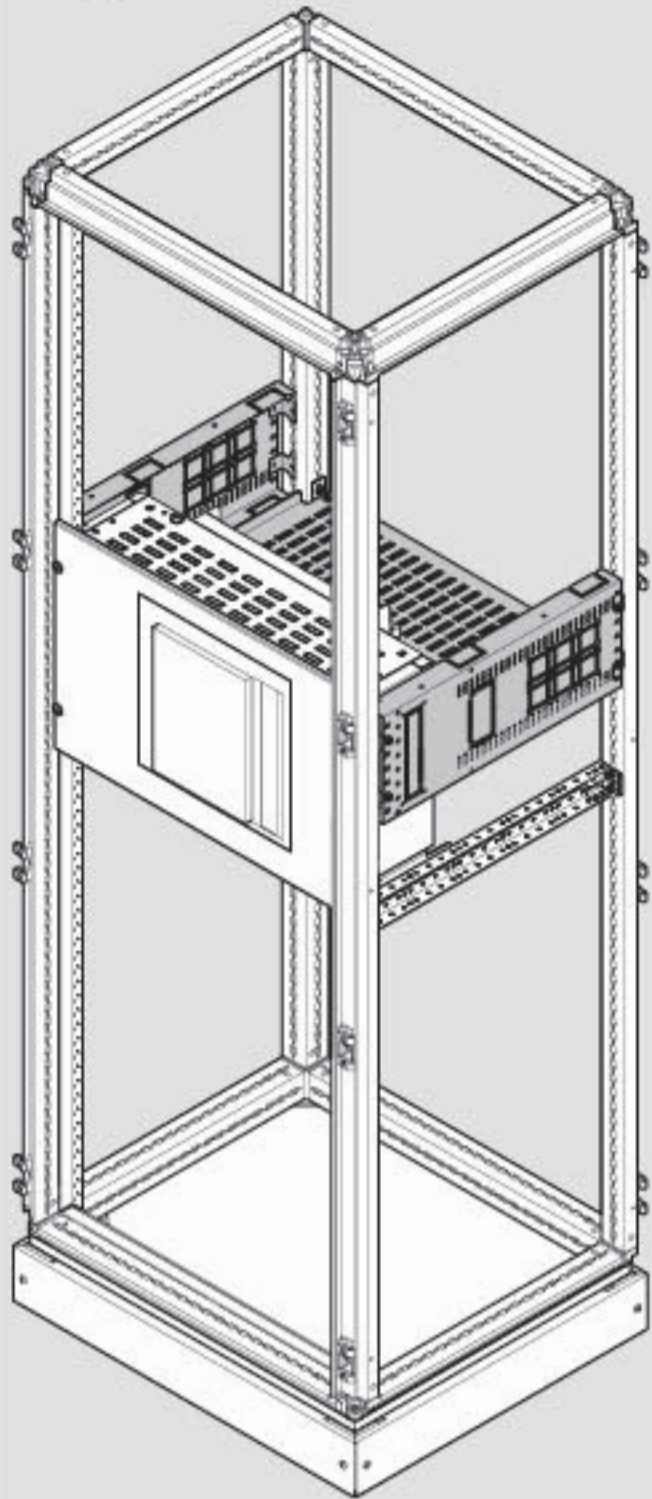




	Device 3/4 Poles	W	Type	Form
	HW1			
UC6040HFHW1	1600A	600	FIX	4b
UC8040HFHW1	1600A	800		
UC6040HDHW1	1600A	600	D/W	
UC8040HDHW1	1600A	800		

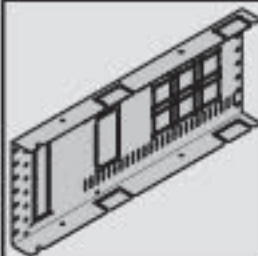	W	H1	D
UC2040FUL	///	200	400
UC2060FUL	///	200	600
UC2080FUL	///	200	800

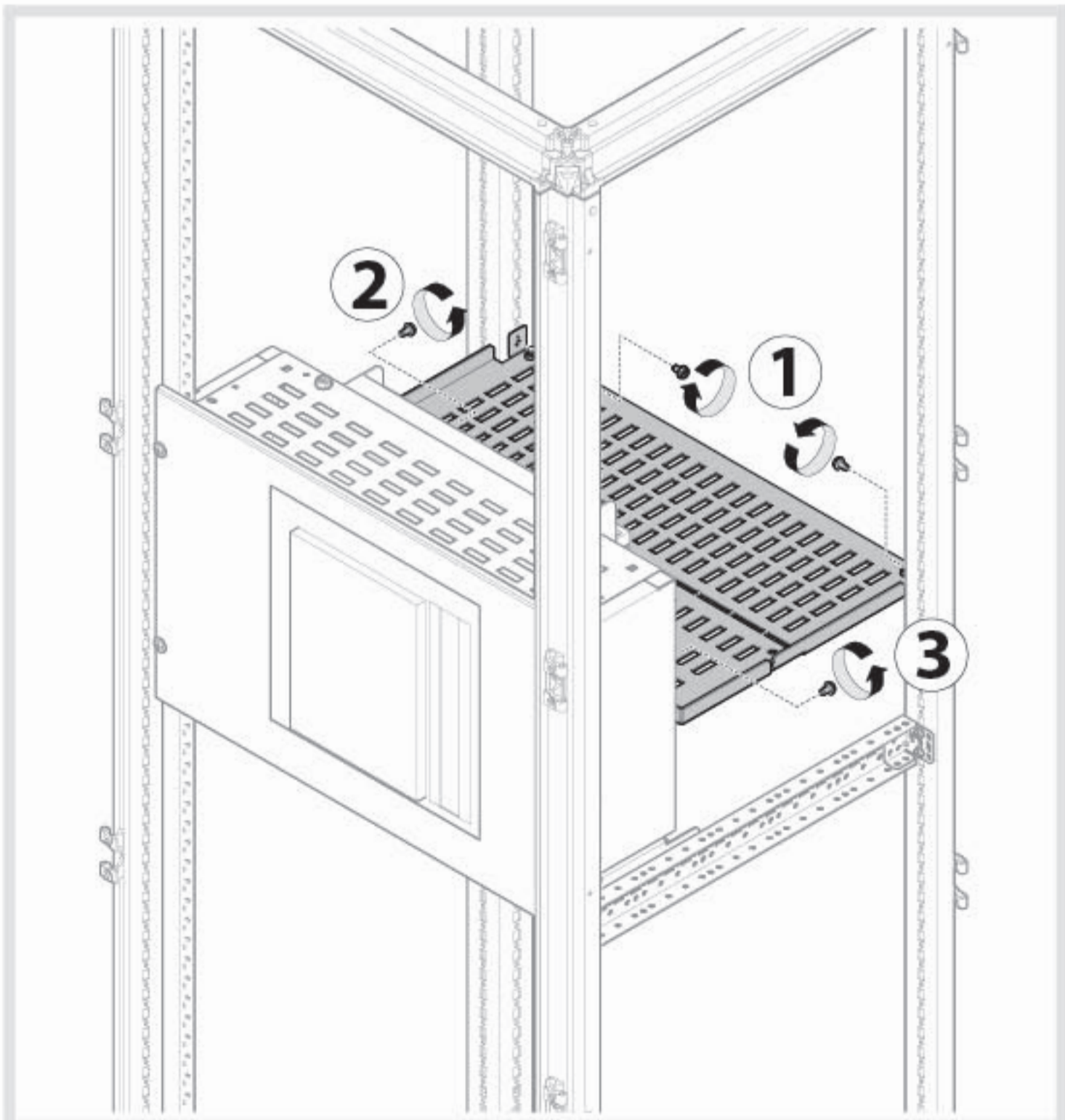






4b

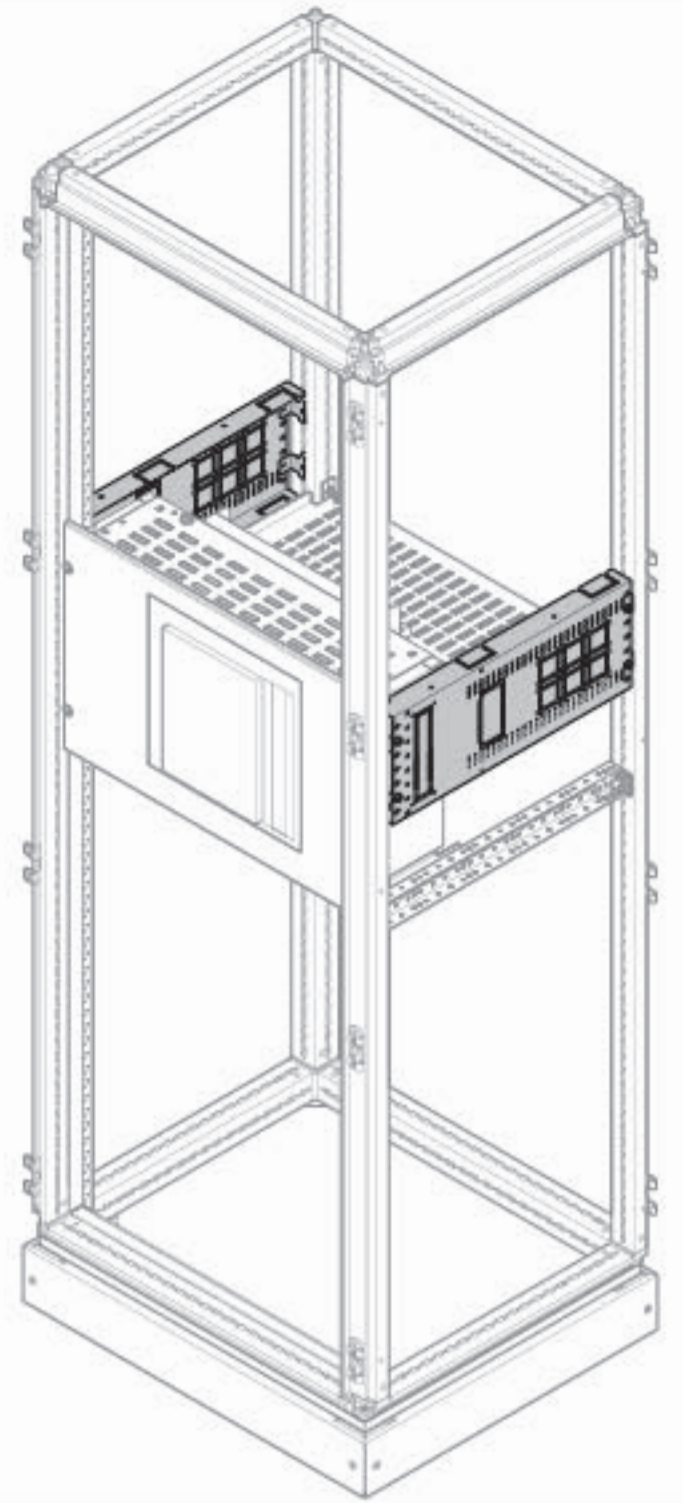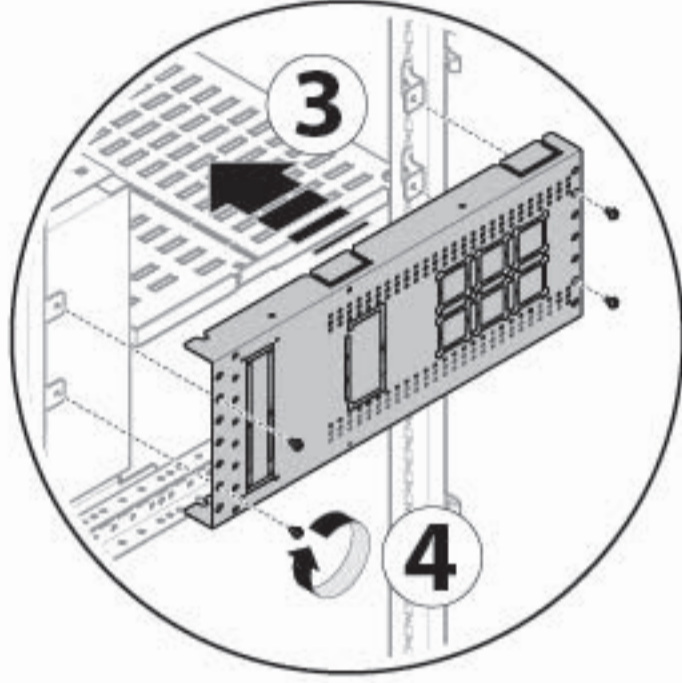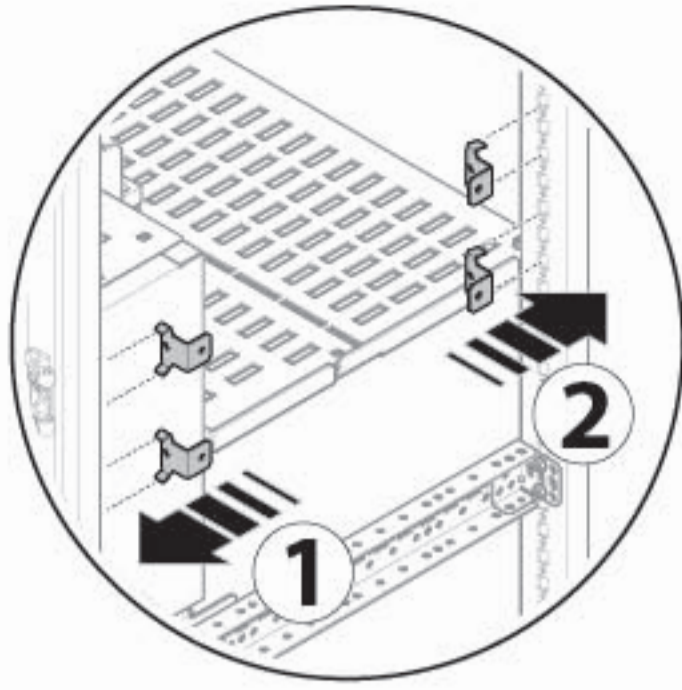

2b

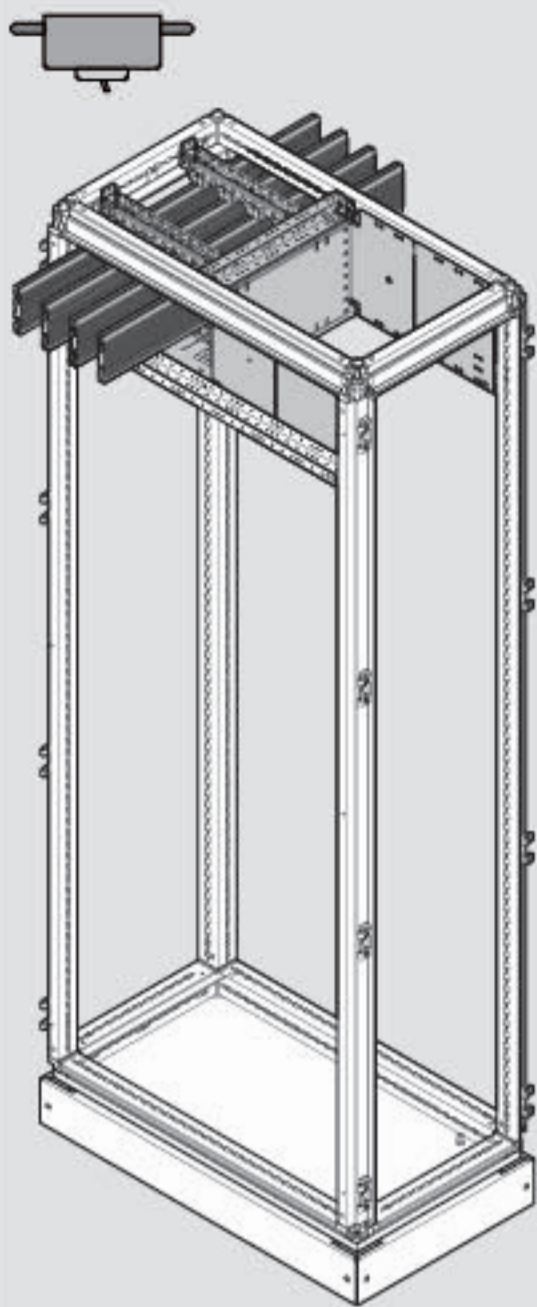



	ITEM	W
	UC350FU UC000FU	450 mm
	UC600FU UC000FU	700 mm
	UC800FU UC000FU	900 mm



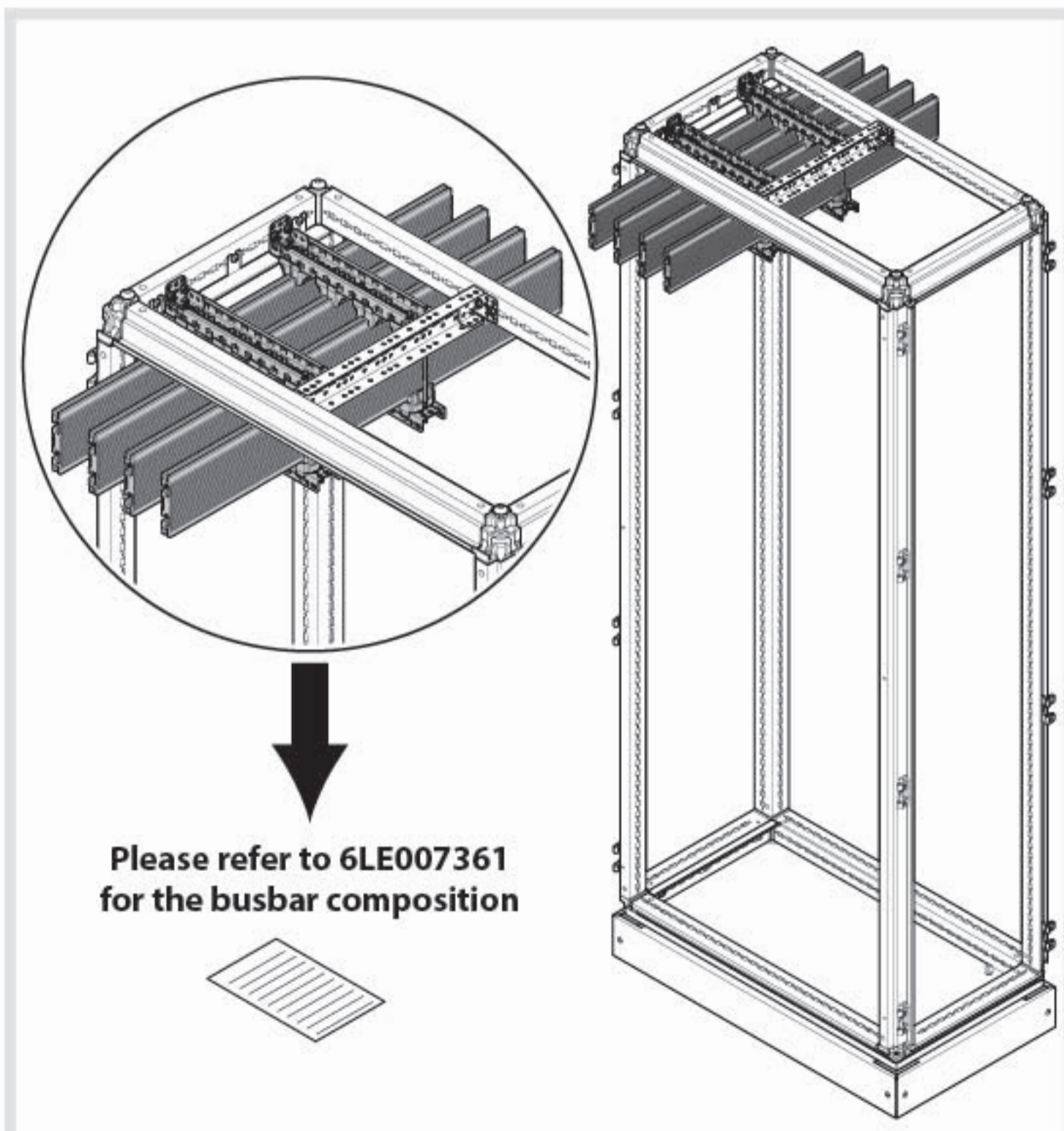
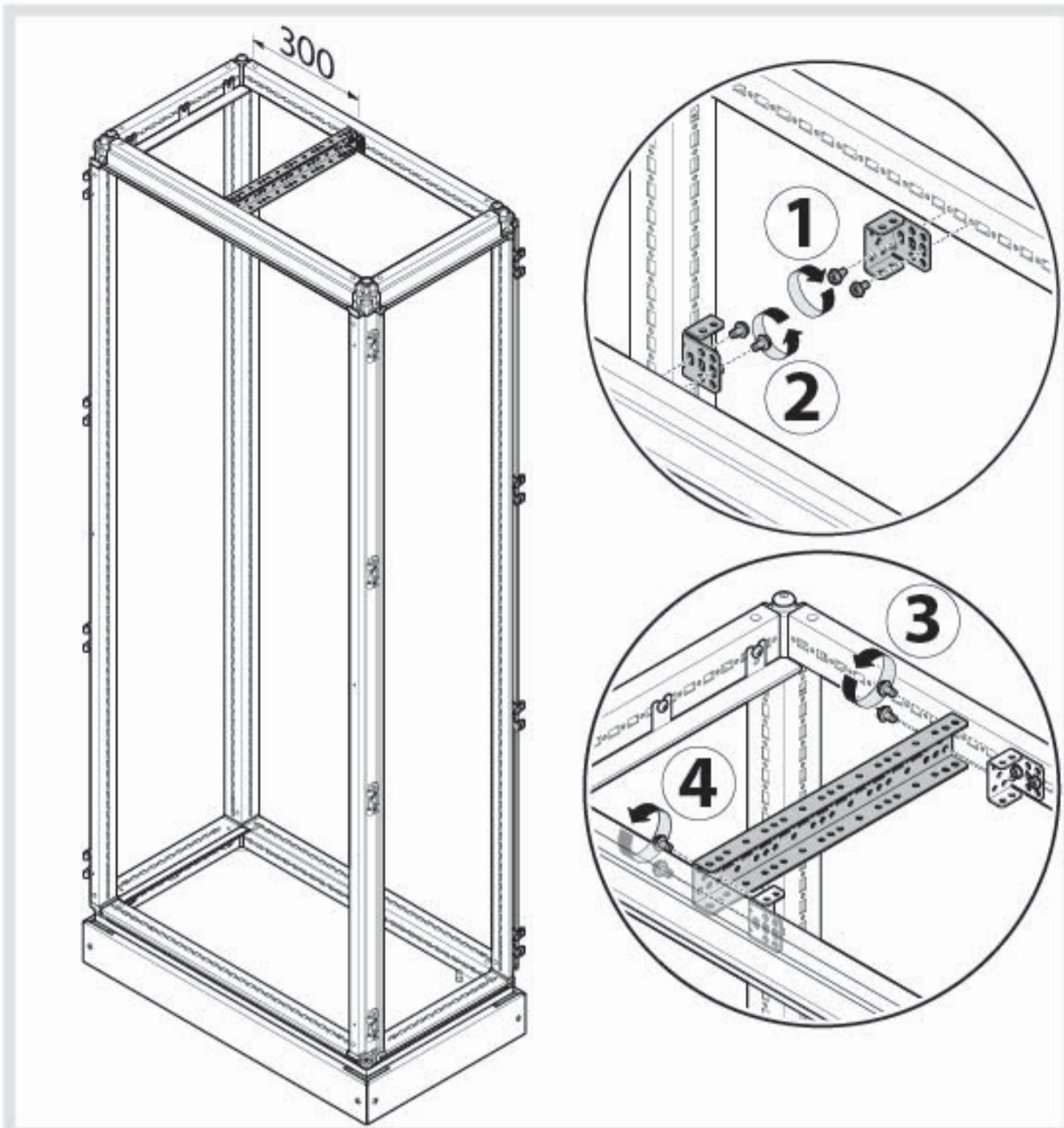


Please refer to 6LE007361
for the busbar composition



2b

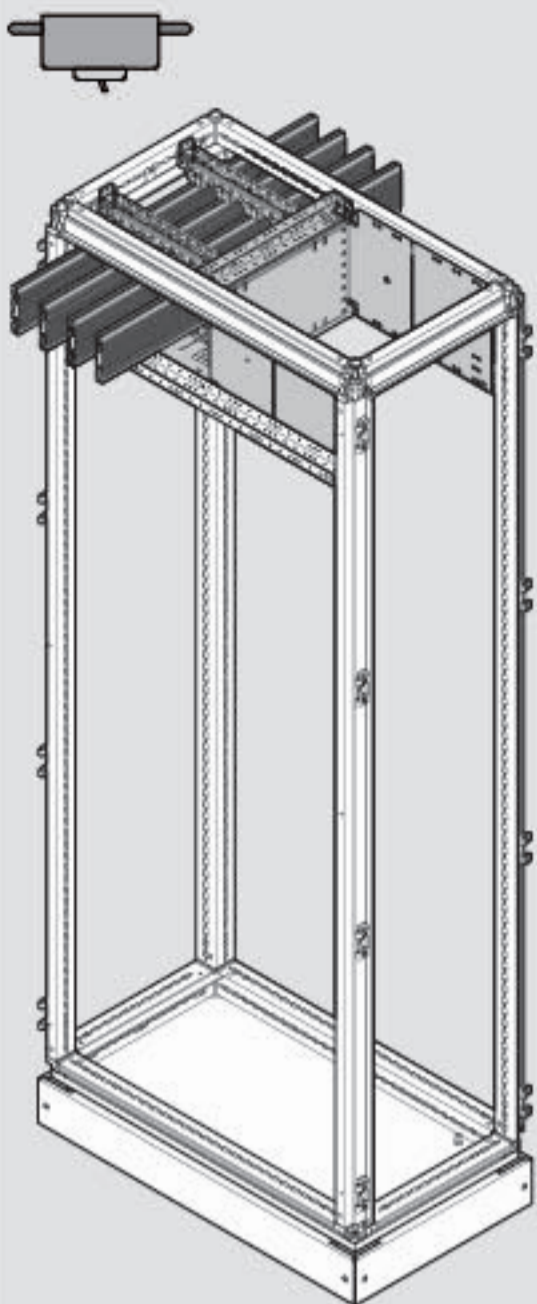





	ITEM	W
	UC500FU UC000FU	600 mm
	UC700FU UC000FU	800 mm

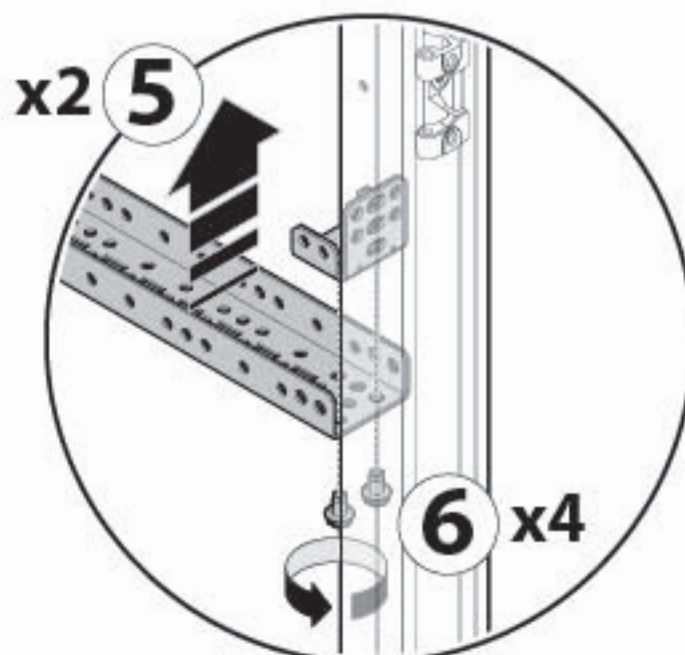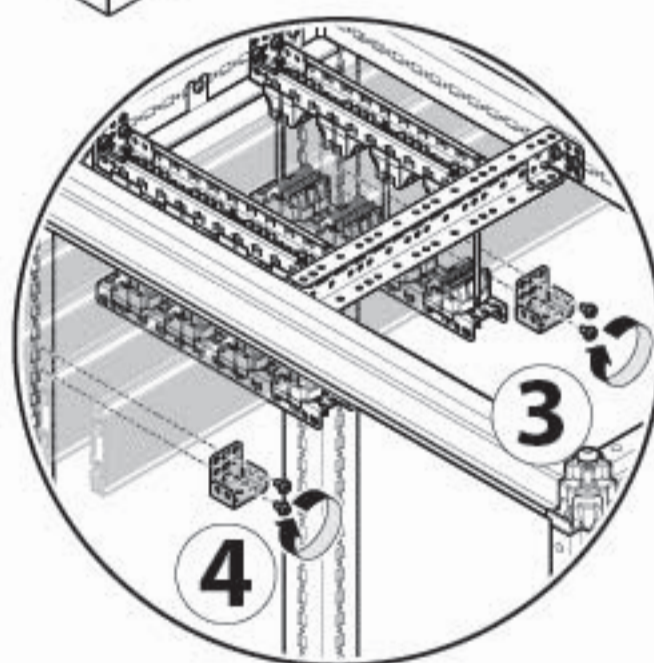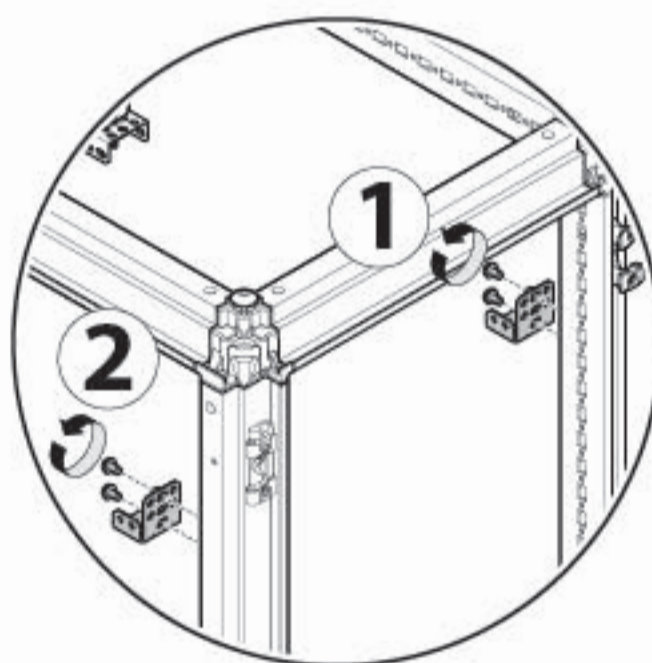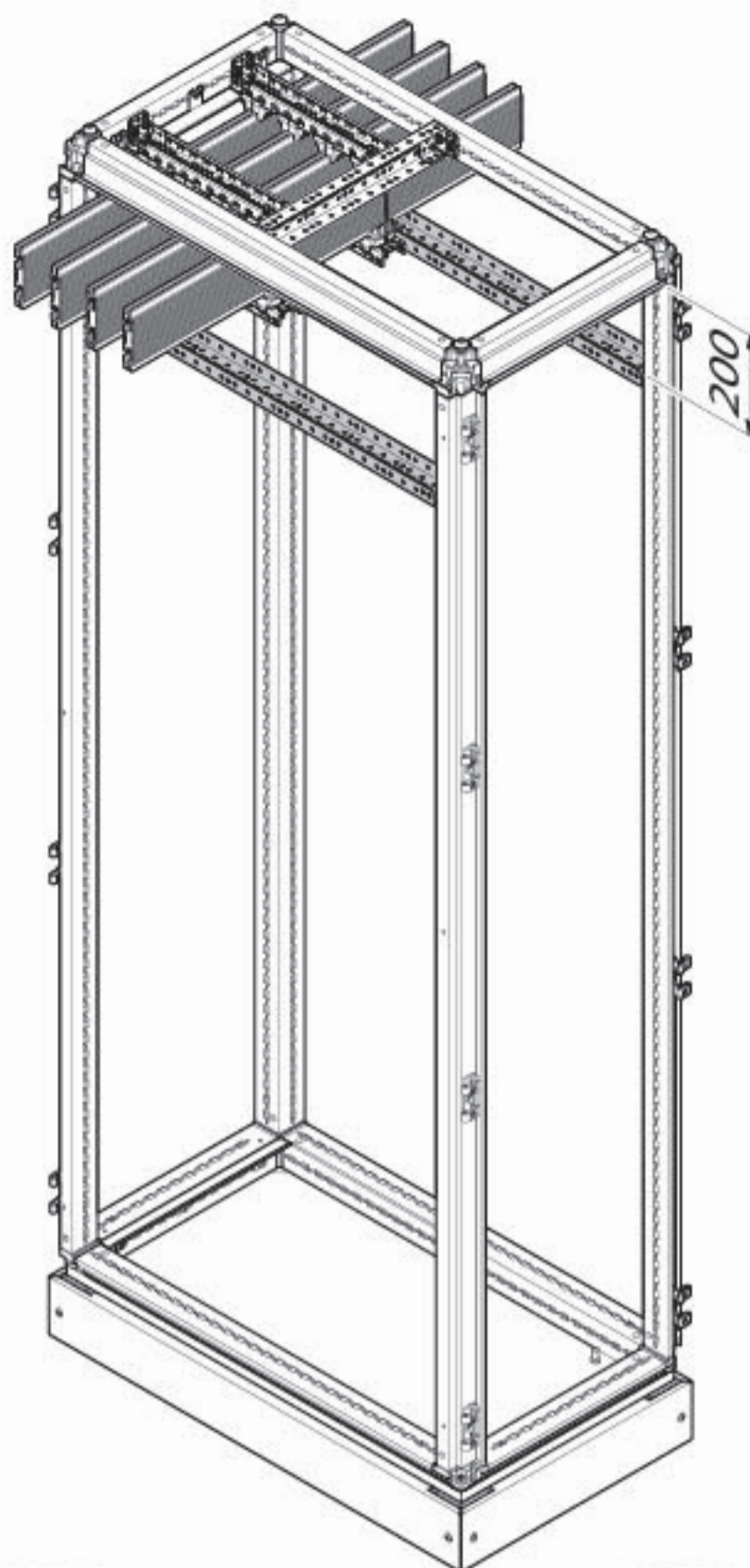



2b

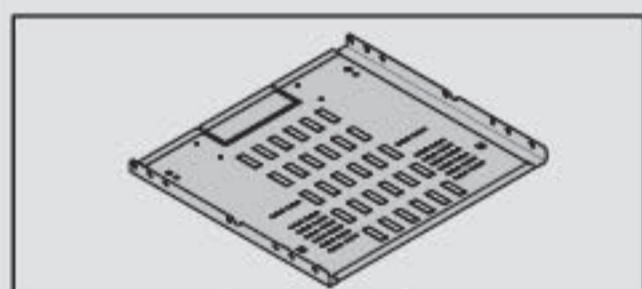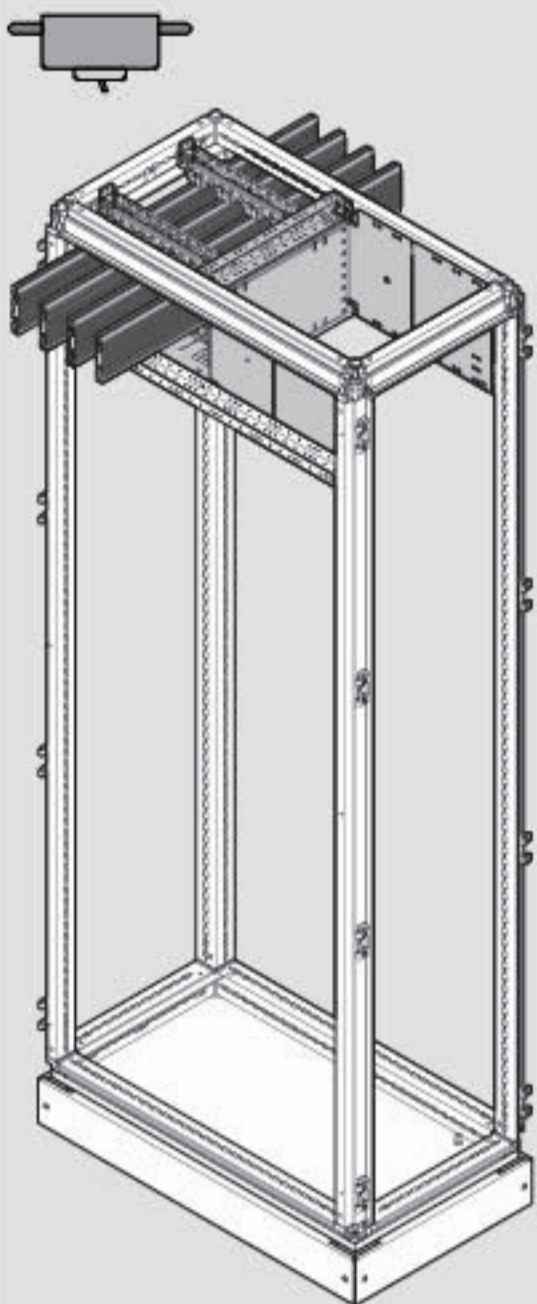

ITEM	W	D
UC3540FUH	450 mm	600/800 mm
UC6040FUH	700 mm	600/800 mm
UC8040FUH	900 mm	600/800 mm

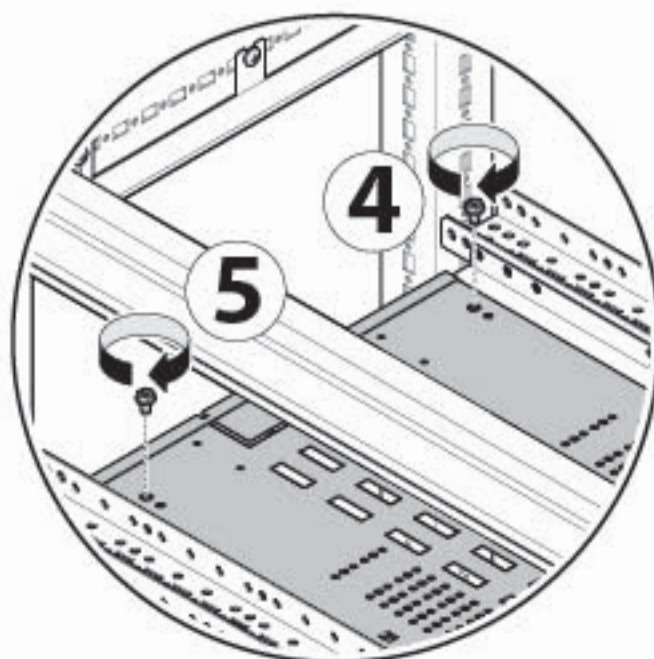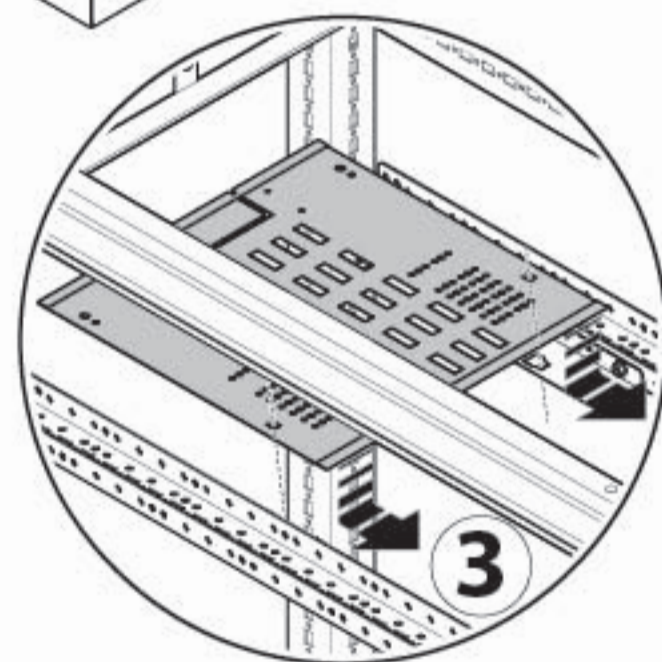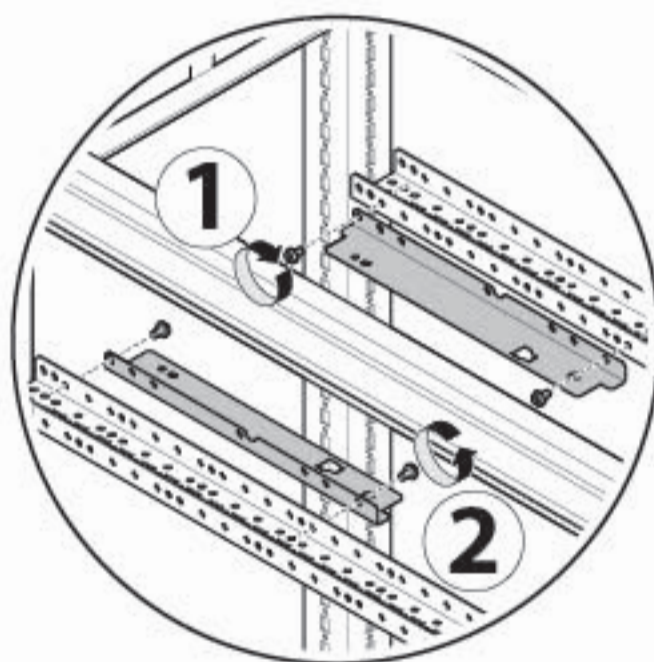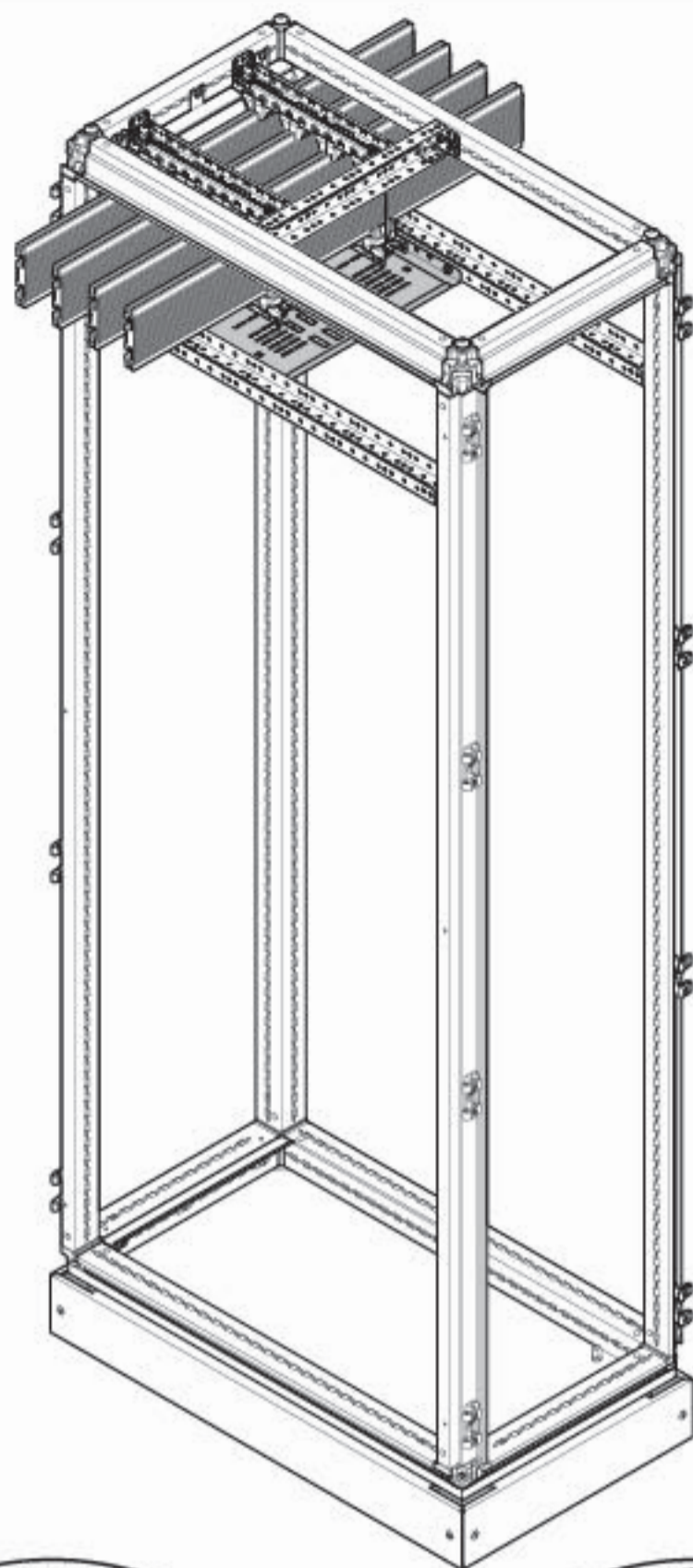




2b

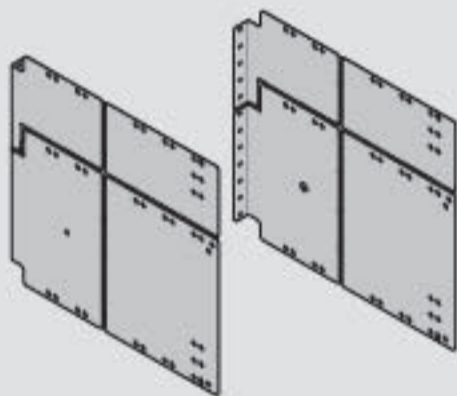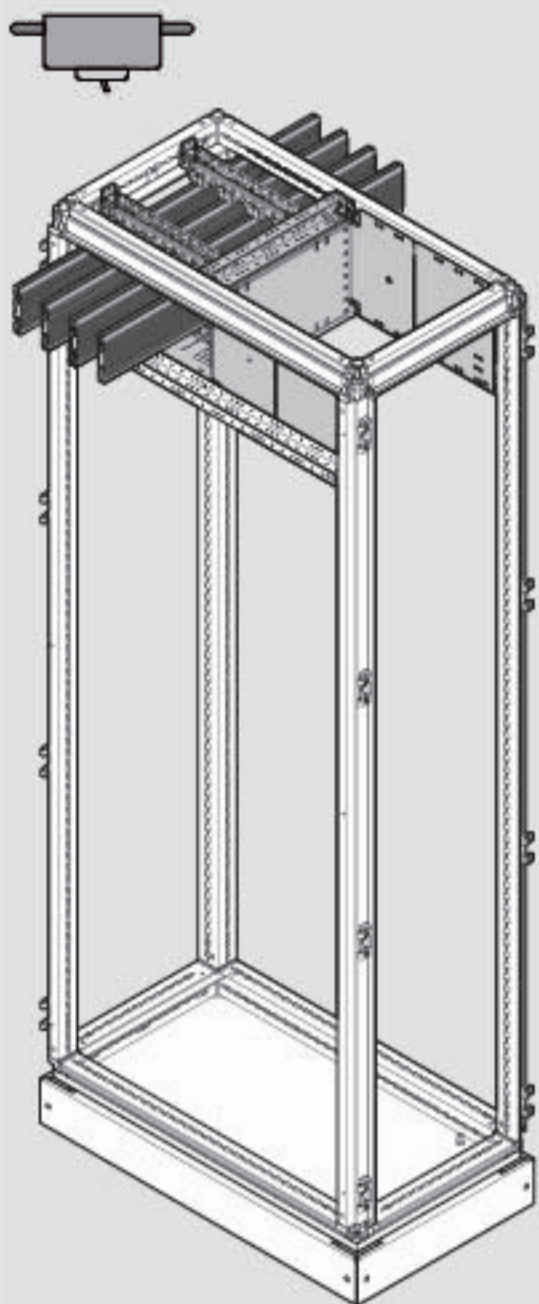


UC3080BSO



1

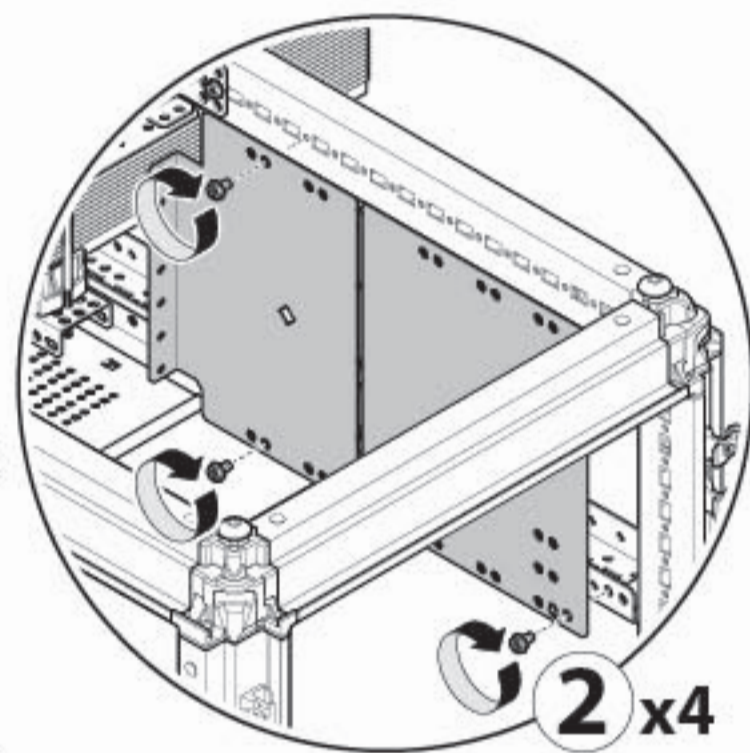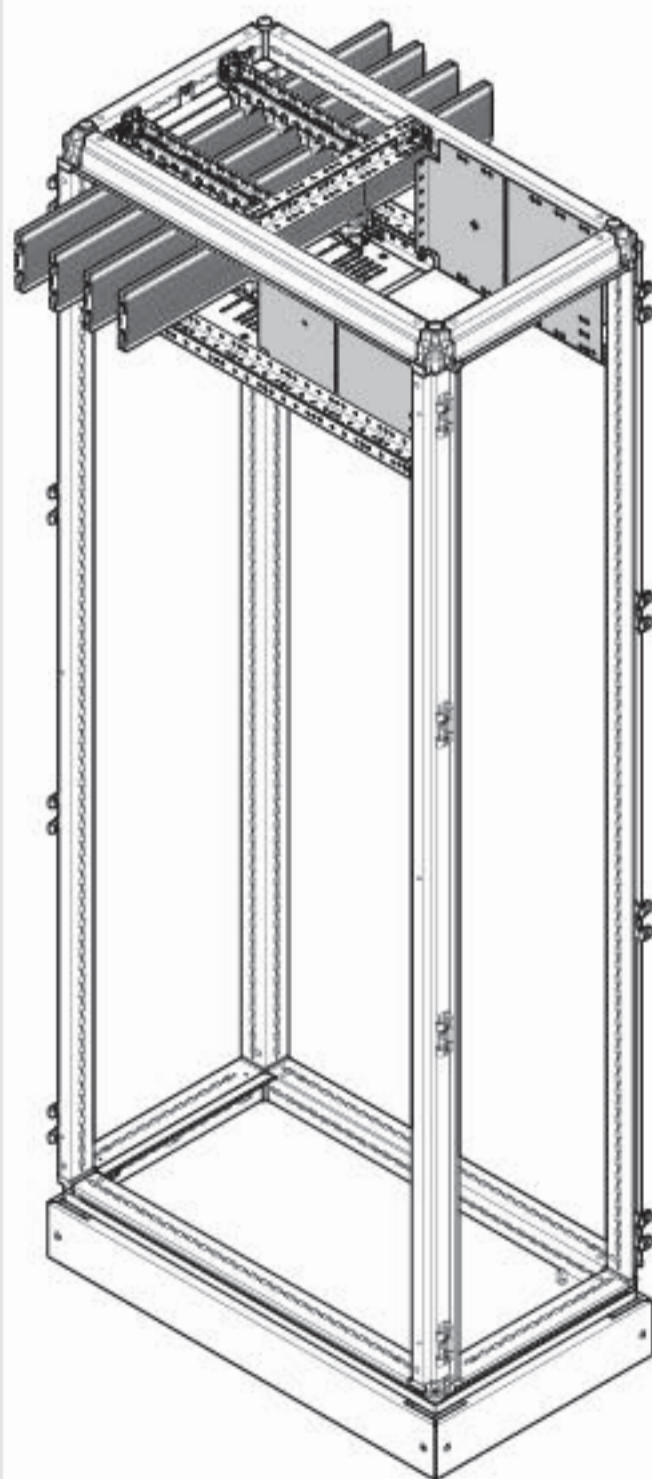
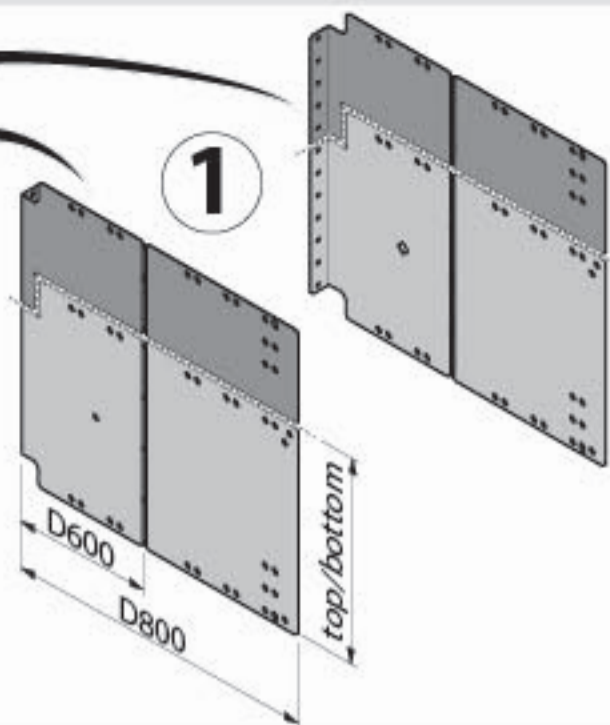


2 x4


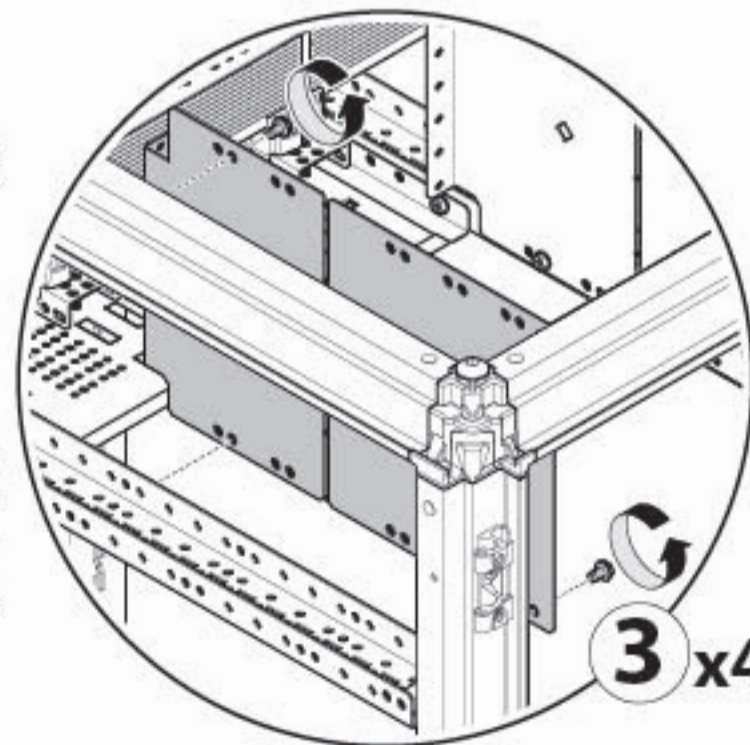


3 x4


2b

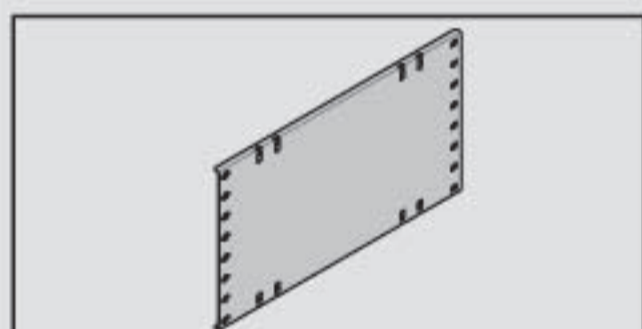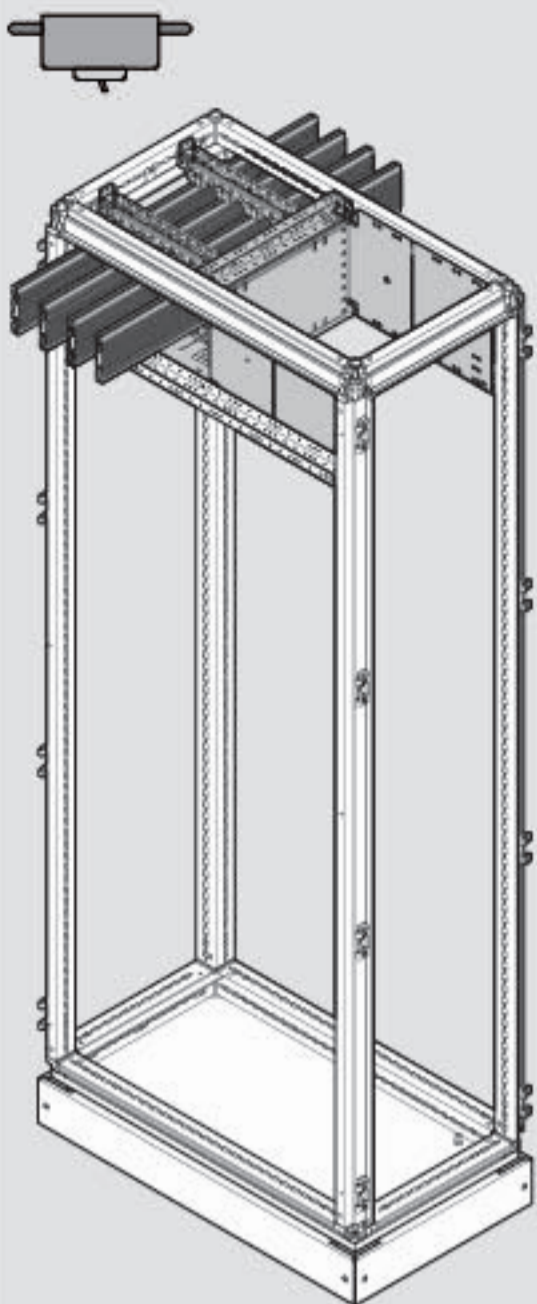








ITEM	W	D
UC3520V	450 mm	600/800 mm
UC6020V	700 mm	600/800 mm
UC8020V	900 mm	600/800 mm

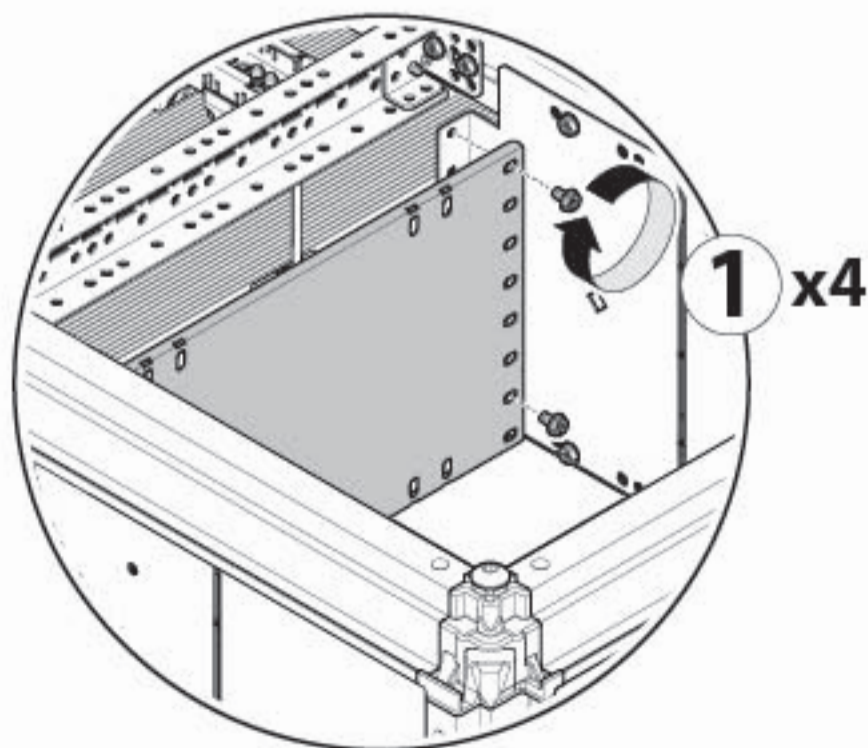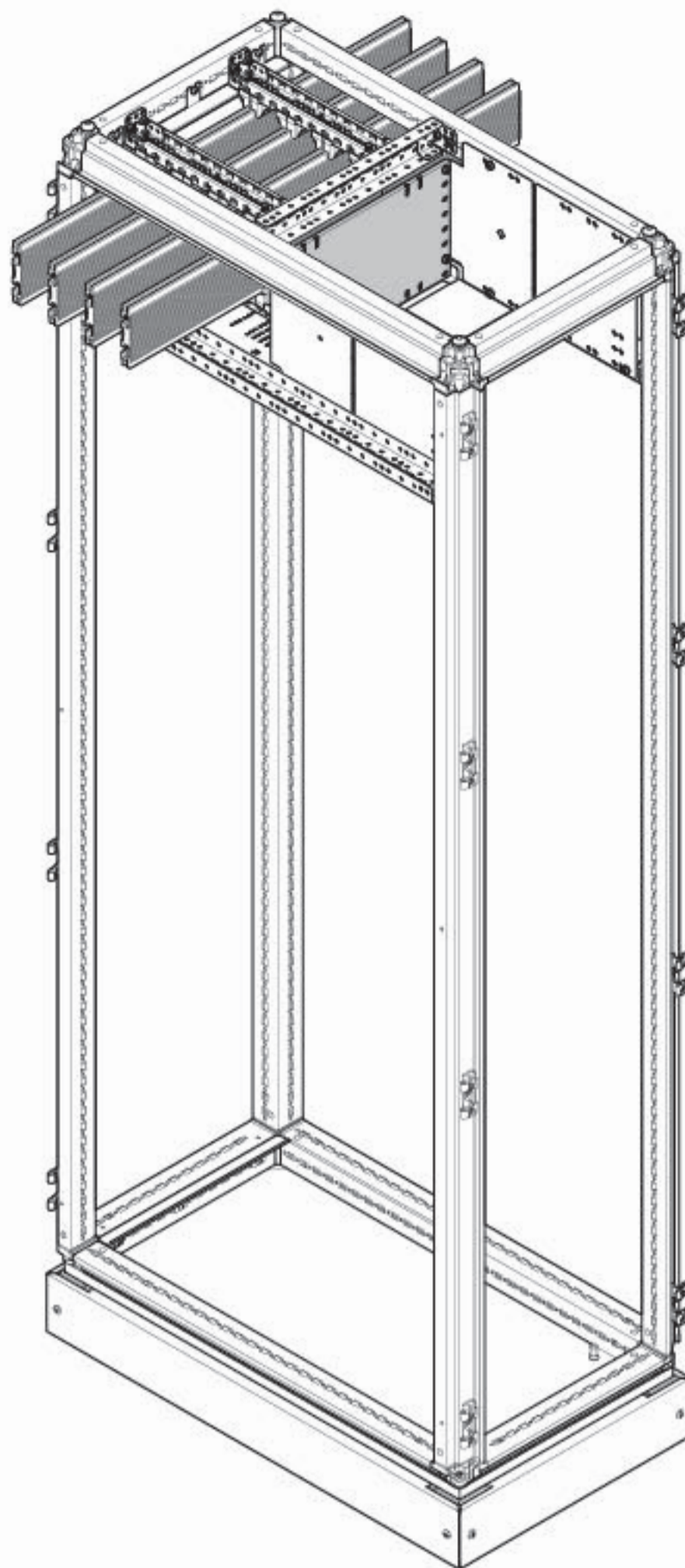


2b

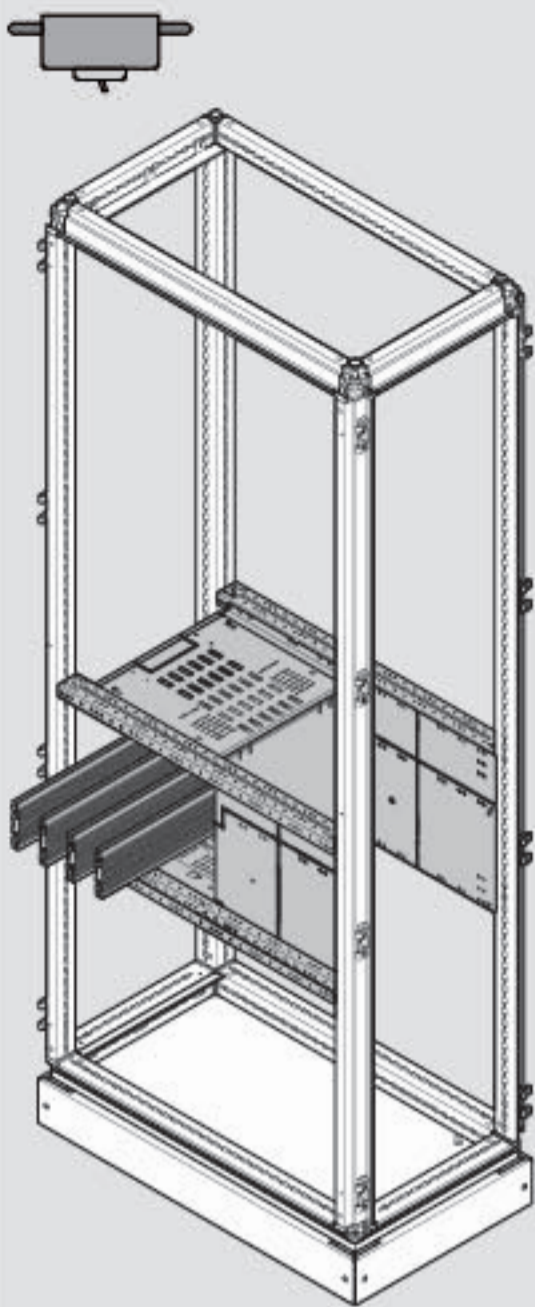



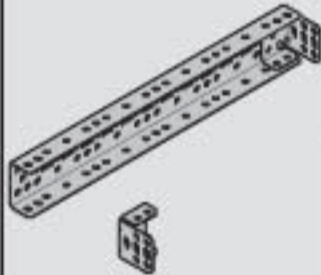
	ITEM	D
	UC500FU UC000FU	600 mm
	UC700FU UC000FU	800 mm

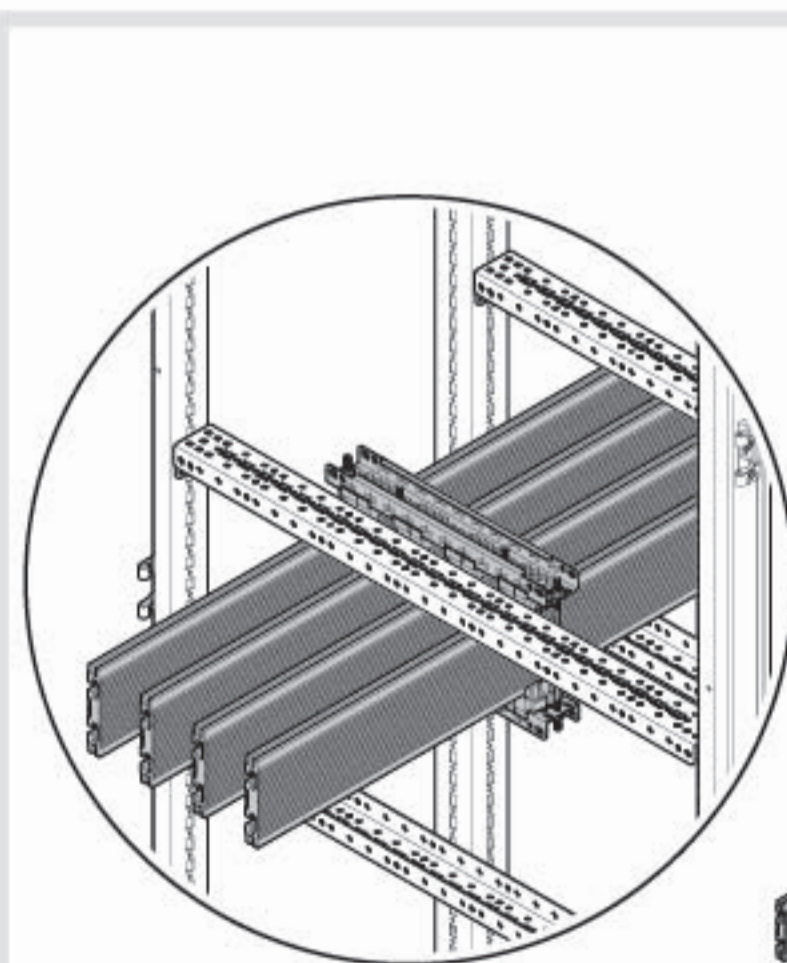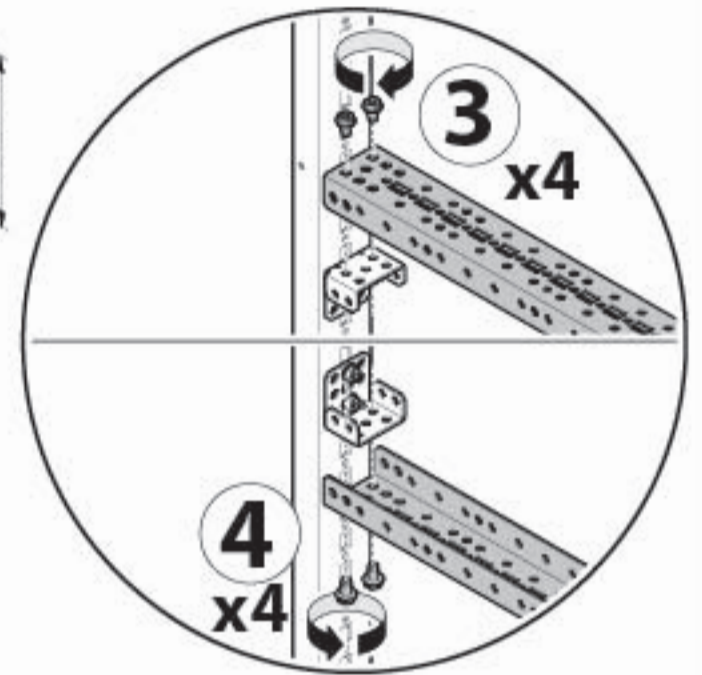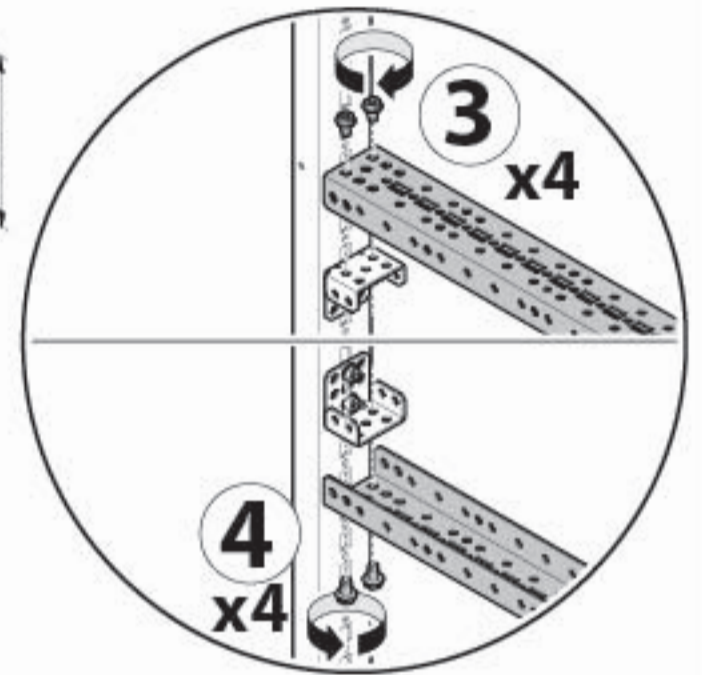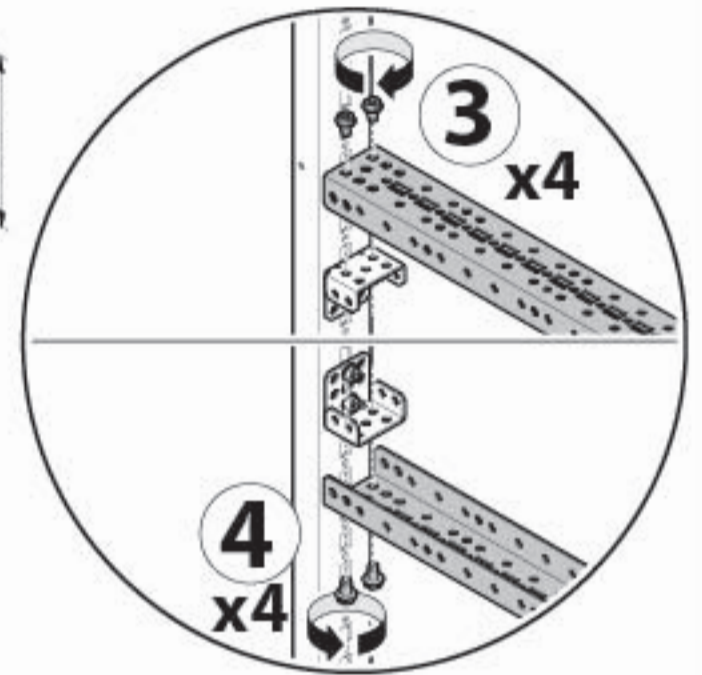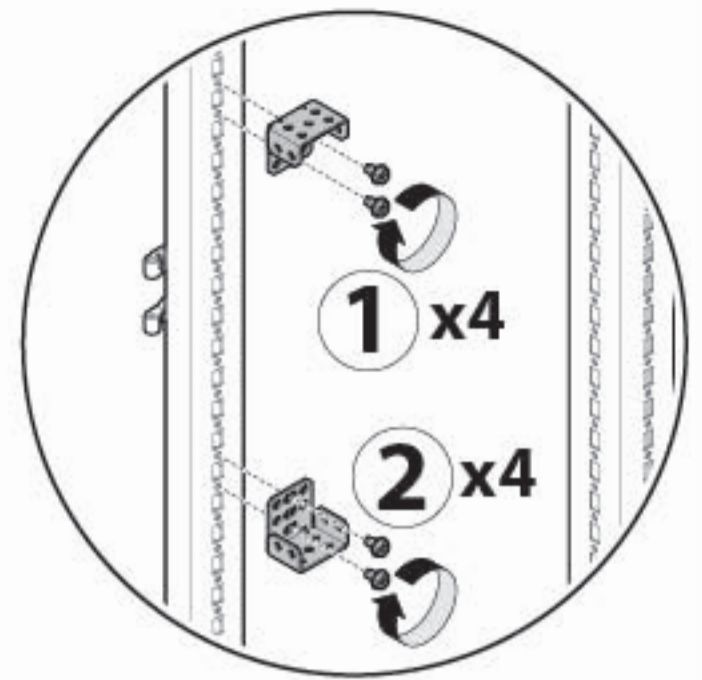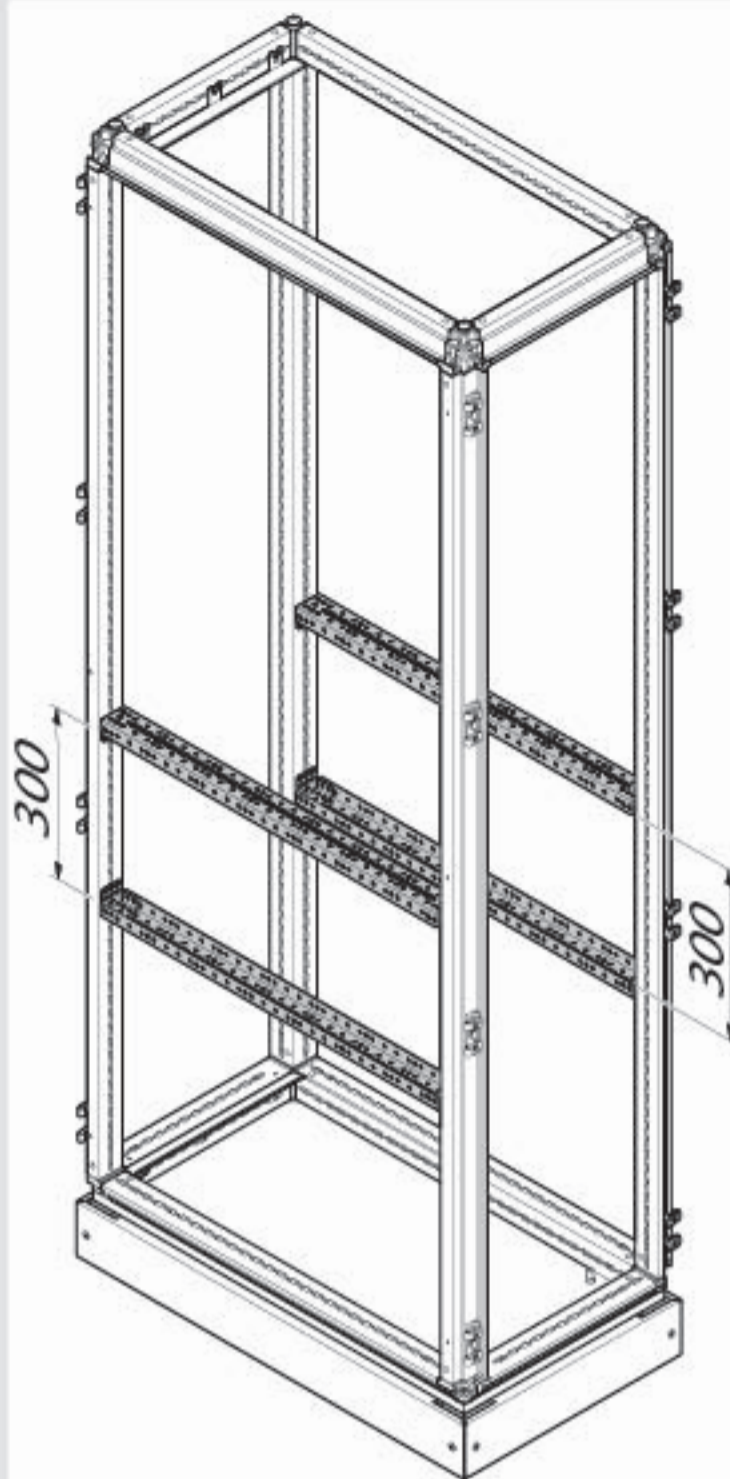





Please refer to 6LE007361 for the busbar composition

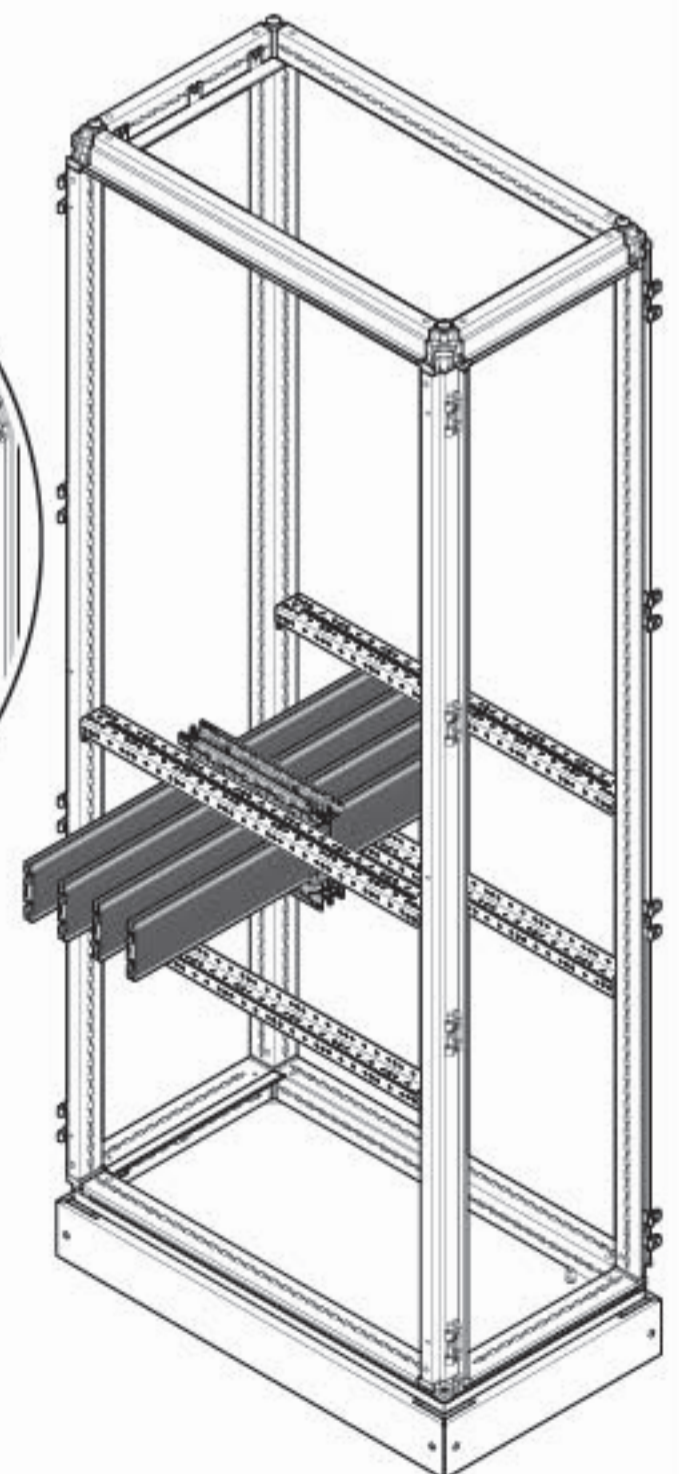



2b

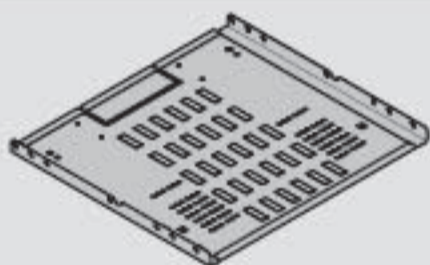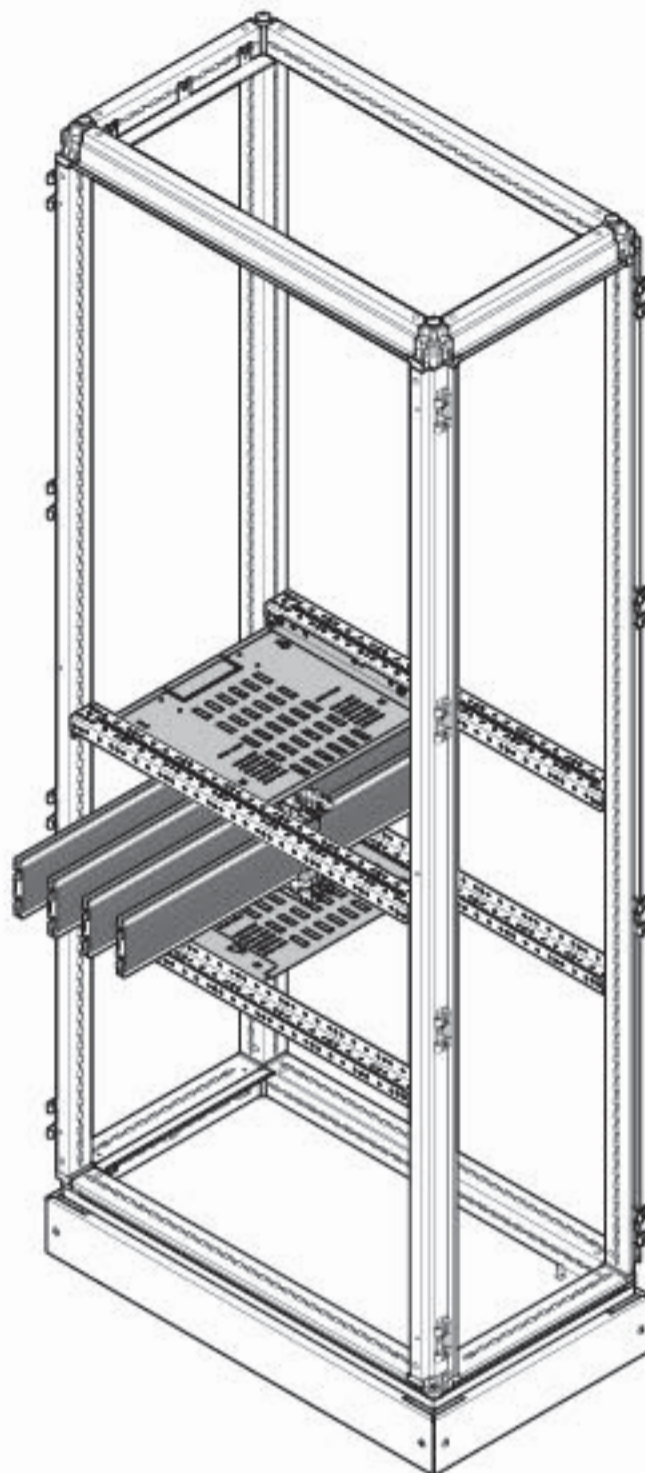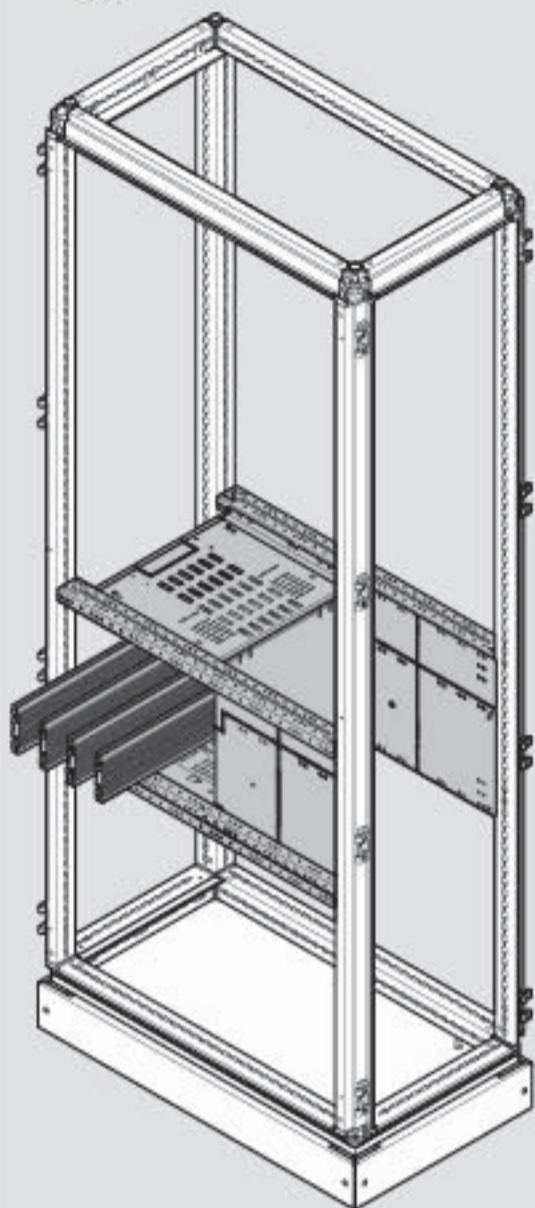







ITEM	W	D
UC3540FUH	450 mm	600/800 mm
UC6040FUH	700 mm	600/800 mm
UC8040FUH	900 mm	600/800 mm

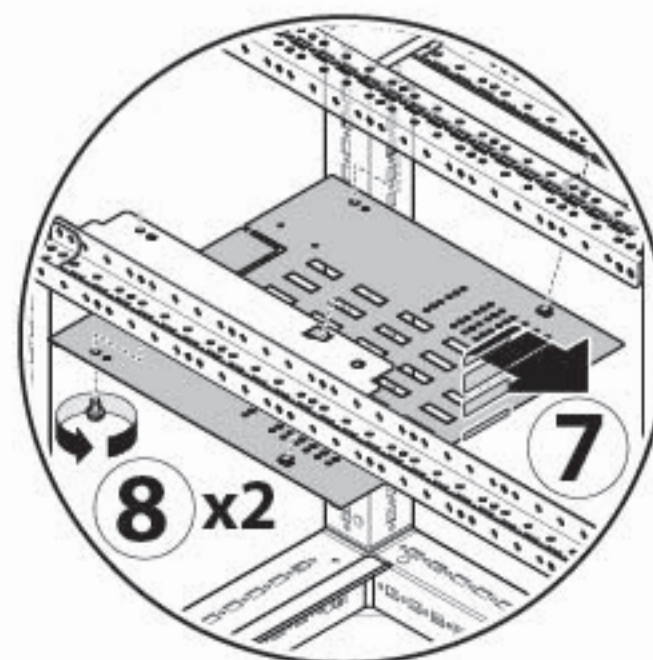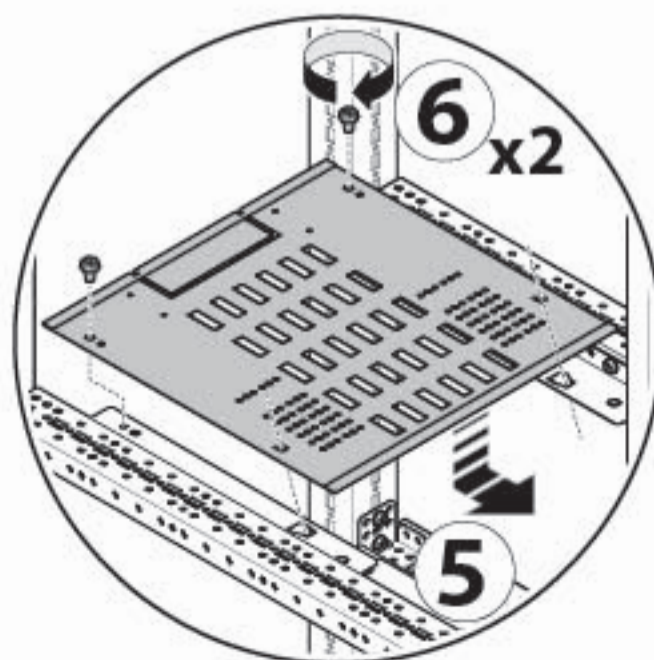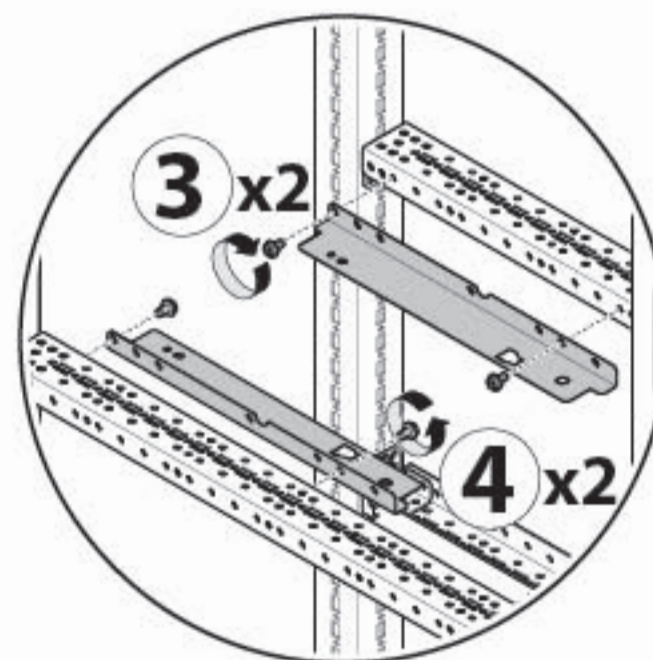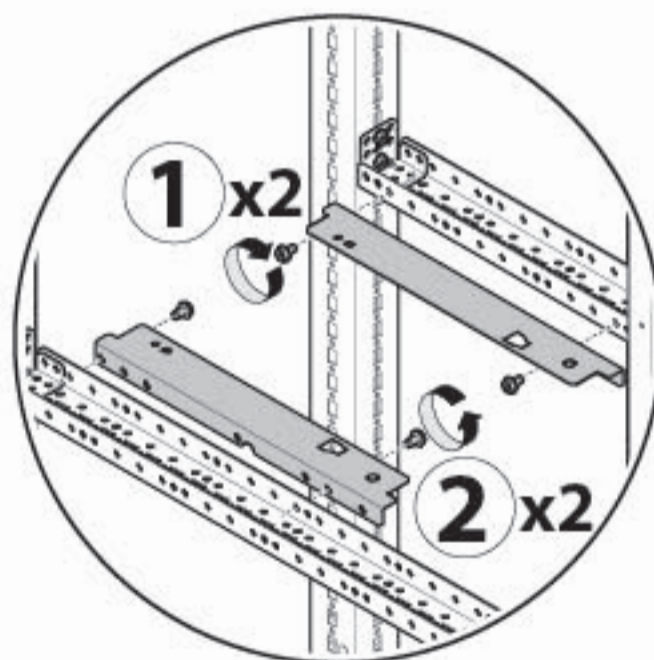

2b

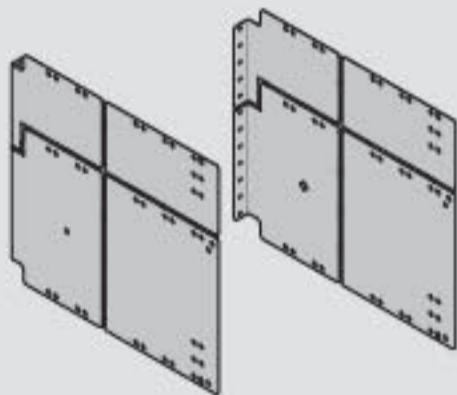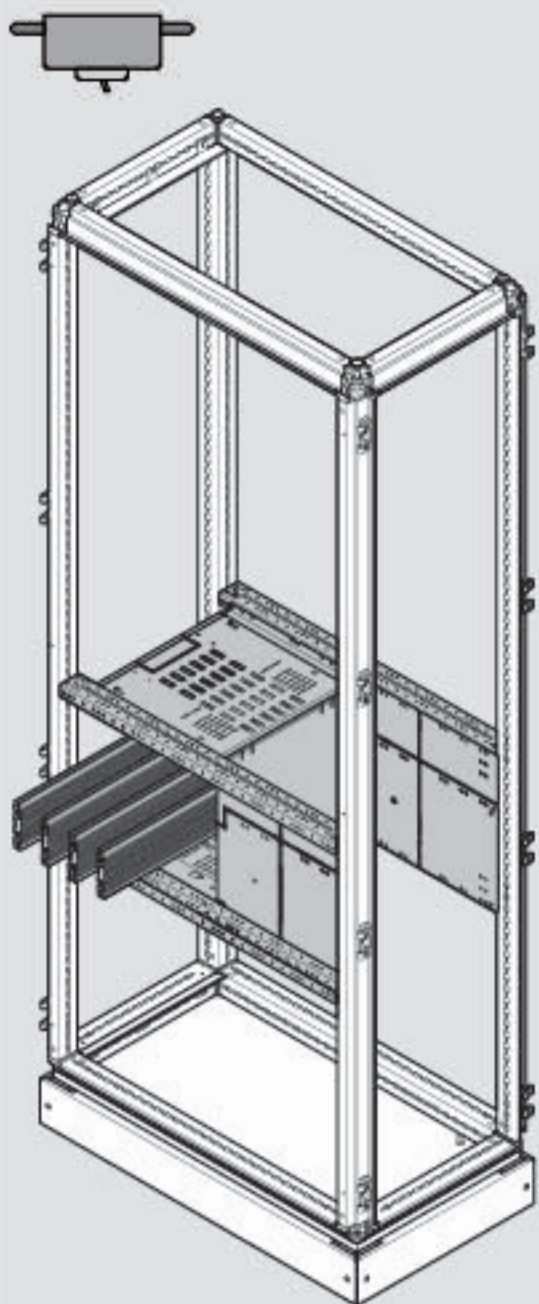

UC3080BS0

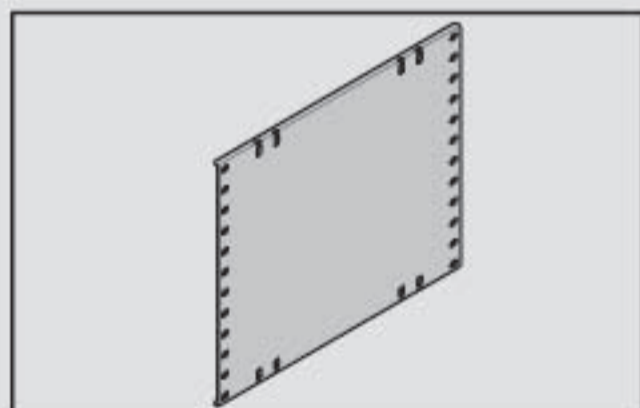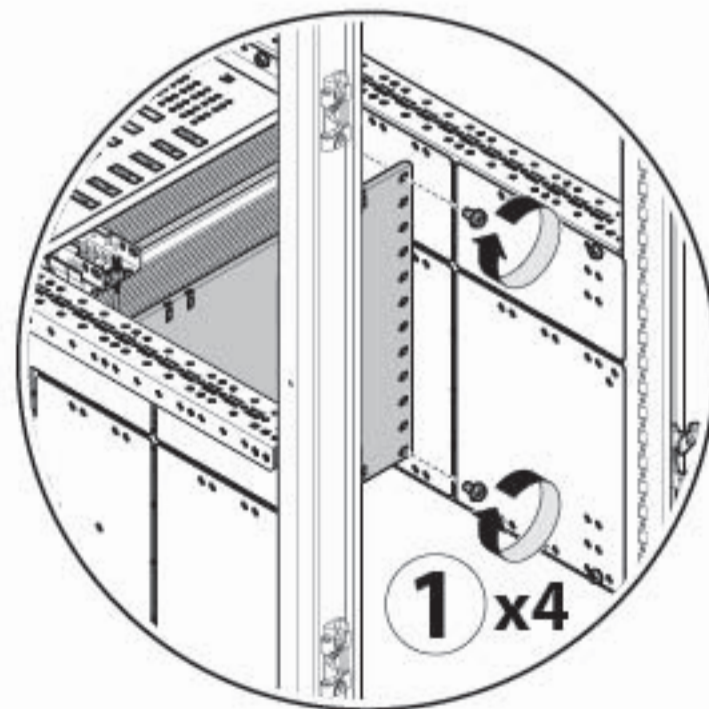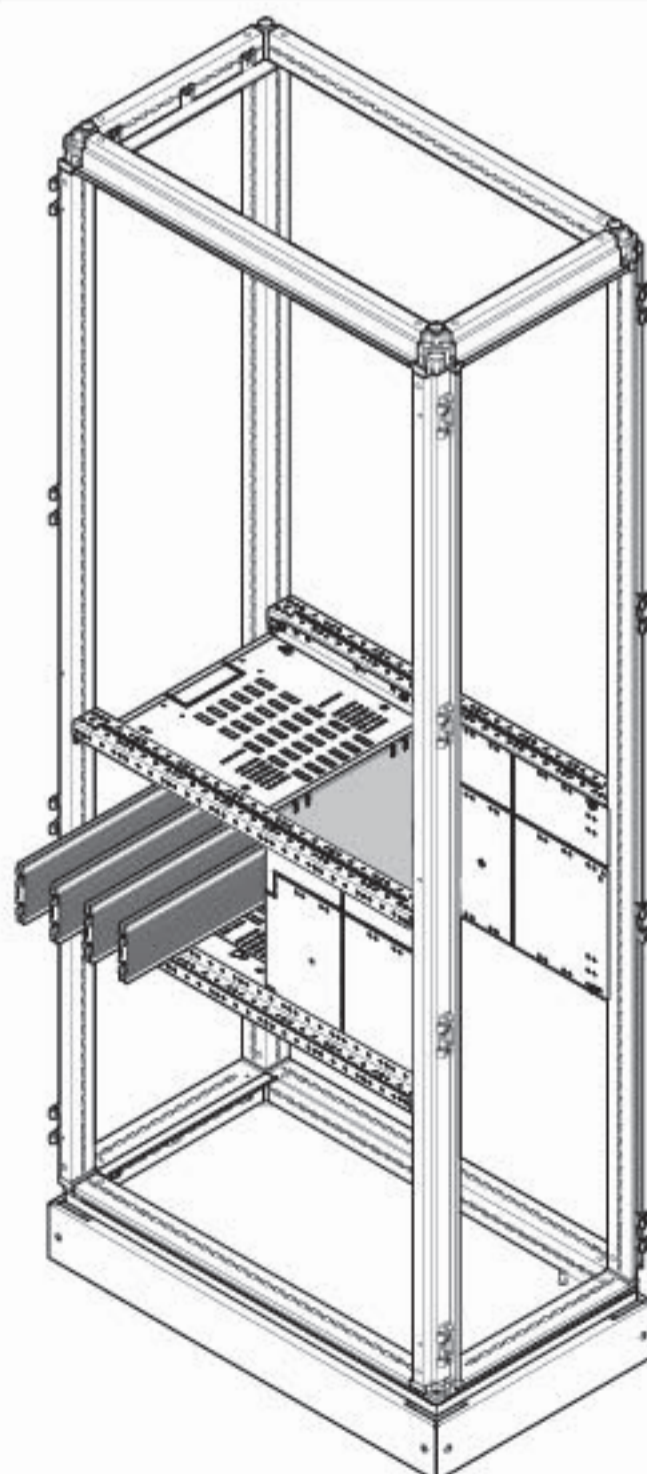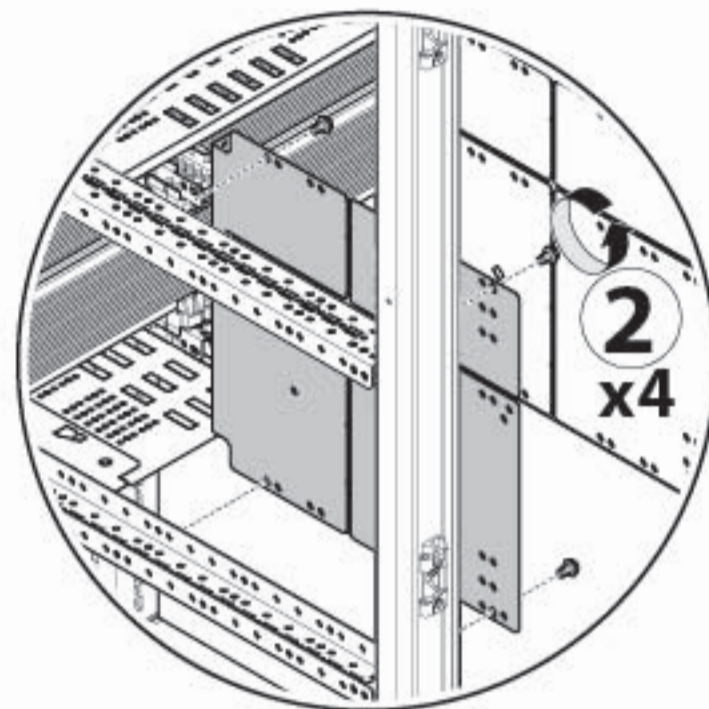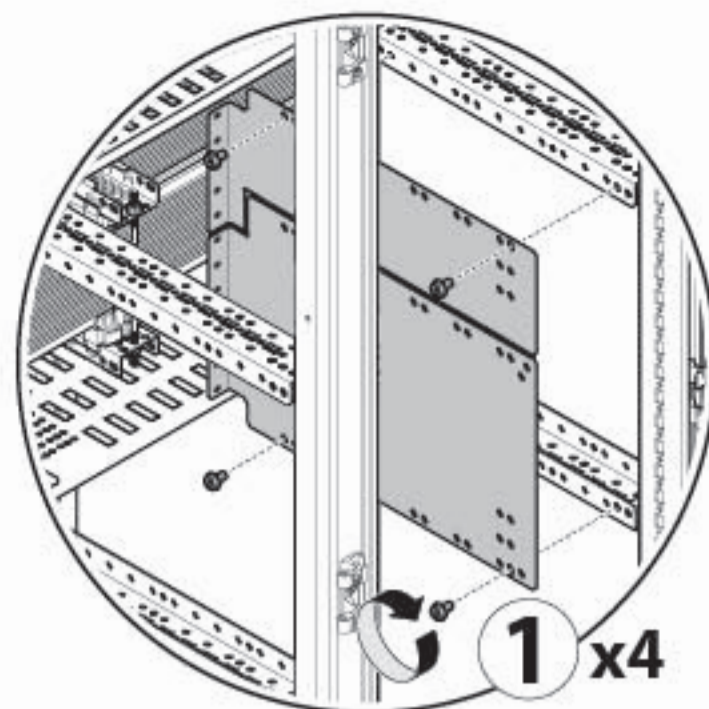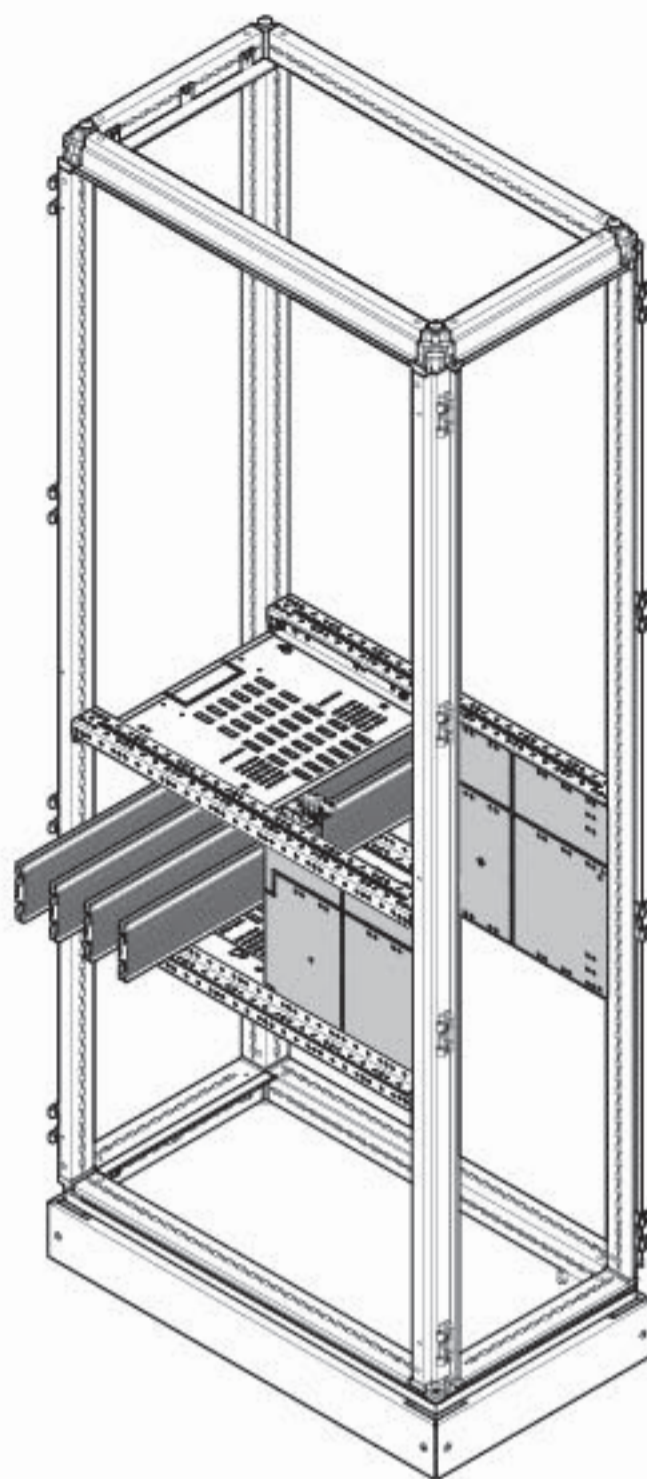

ITEM	W	D
UC3530V	450 mm	600/800 mm
UC6030V	700 mm	600/800 mm
UC8030V	900 mm	600/800 mm

