
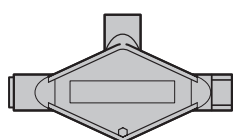


orion.inox

- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu

- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Mont žas instrukcija
- (PL) Instrukcja monta owa
- (RO) Instructiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar

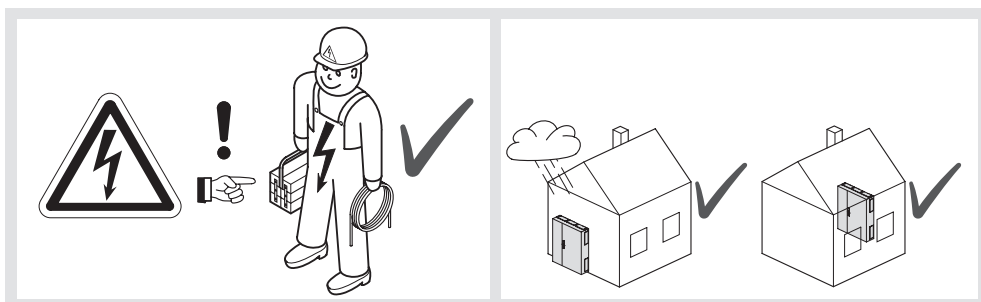

x 1



x 2





x 2



x 2






x 4 / x 8

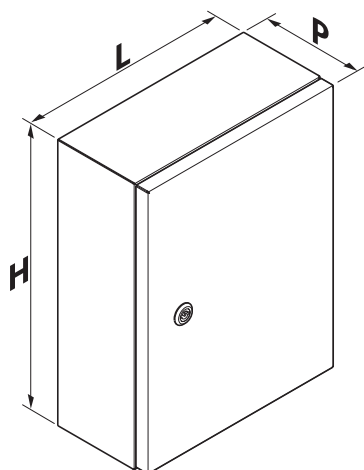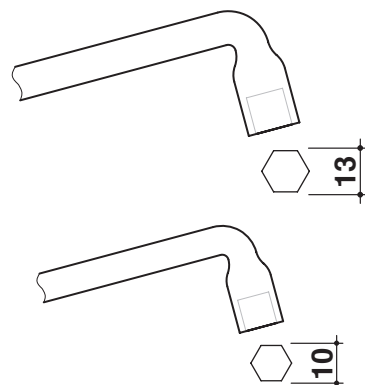

AISI 304	AISI 316	H	L	P
FL010BW	FL010BWL	300	200	150
FL012BW	FL012BWL	300	300	210
FL013BW	FL013BWL	300	400	150
FL014BW	FL014BWL	400	300	150
FL015BW	FL015BWL	400	300	210
FL016BW	FL016BWL	400	400	210
FL017BW	FL017BWL	400	600	210
FL021BW	FL021BWL	500	400	210
FL023BW	FL023BWL	500	500	210
FL024BW	FL024BWL	500	500	250
FL025BW	FL025BWL	600	400	210
FL027BW	FL027BWL	600	500	210
FL028BW	FL028BWL	600	600	210
FL029BW	FL029BWL	600	600	250
FL030BW	FL030BWL	600	600	300
FL032BW	FL032BWL	600	800	300
FL053BW	FL053BWL	600	1000	300
FL033BW	FL033BWL	700	500	210
FL034BW	FL034BWL	700	500	250


AISI 304	AISI 316	H	L	P
FL035BW	FL035BWL	800	600	210
FL036BW	FL036BWL	800	600	250
FL037BW	FL037BWL	800	600	300
FL039BW	FL039BWL	800	800	300
FL054BW	FL054BWL	800	1000	300
FL055BW	FL055BWL	800	1200	300
FL041BW	FL041BWL	1000	600	300
FL042BW	FL042BWL	1000	800	300
FL056BW	FL056BWL	1000	1000	300
FL043BW	FL043BWL	1200	600	300
FL045BW	FL045BWL	1200	800	300
FL058BW	FL058BWL	1200	1000	300
FL060BW	FL060BWL	1200	1200	300
FL049BW	FL049BWL	1400	800	300
FL062BW	FL062BWL	1400	1000	300
FL064BW	FL064BWL	1400	1200	300
FL051BW	FL051BWL	1600	800	300

UZ...W

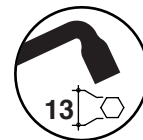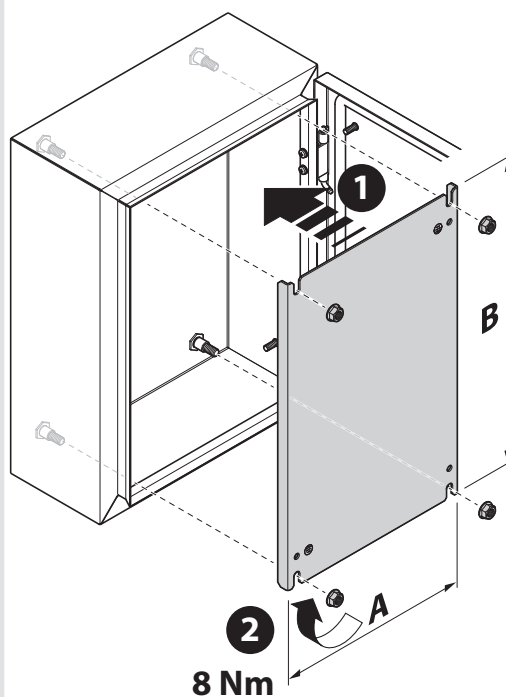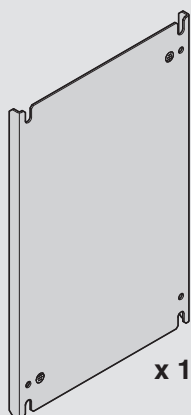


	H	L	A	B	
UZ2030W	300	200	265	135	60
UZ3030W	300	300	265	235	66
UZ4030W	300	400	265	335	72
UZ3040W	400	300	365	235	72
UZ4040W	400	400	365	335	76
UZ6040W	400	600	365	535	94
UZ4050W	500	400	465	335	82
UZ5050W	500	500	465	435	100
UZ4060W	600	400	565	335	94
UZ5060W	600	500	565	435	110
UZ6060W	600	600	565	535	122
UZ8060W	600	800	569	735	126
UZ10060W	600	1000	569	935	138
UZ5070W	700	500	665	435	116
UZ6080W	800	600	765	535	126
UZ8080W	800	800	769	735	144
UZ10080W	800	1000	769	935	154
UZ12080W	800	1200	769	1135	166
UZ60100W	1000	600	965	535	138
UZ80100W	1000	800	969	735	154
UZ100100W	1000	1000	969	935	172
UZ60120W	1200	600	1165	535	150
UZ80120W	1200	800	1169	735	166
UZ100120W	1200	1000	1169	935	182
UZ120120W	1200	1200	1169	1135	198
UZ80140W	1400	800	1369	735	176
UZ100140W	1400	1000	1369	1135	204
UZ140140W	1400	1200	1369	1335	210
UZ80160W	1600	800	1569	735	188

UZ...PPW

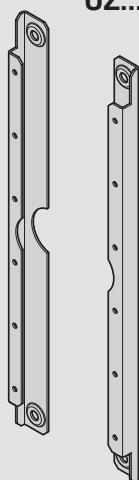


x 4 / x 6

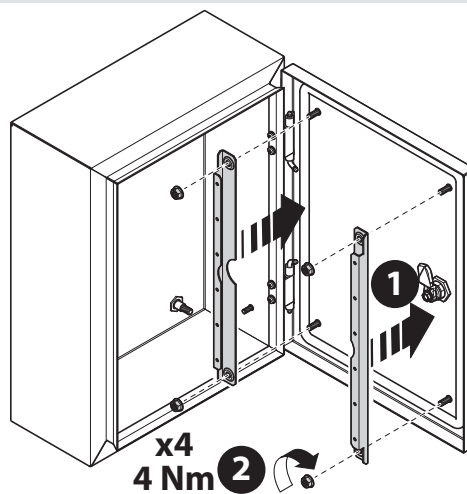


	H
UZ010PPW	300
UZ011PPW	400
UZ012PPW	450
UZ013PPW	500
UZ014PPW	600
UZ015PPW	700
UZ016PPW	800
UZ018PPW	1000
UZ019PPW	1200
UZ020PPW	1400
UZ021PPW	1600

UZ020W x1

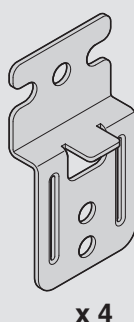


x 4

x 4

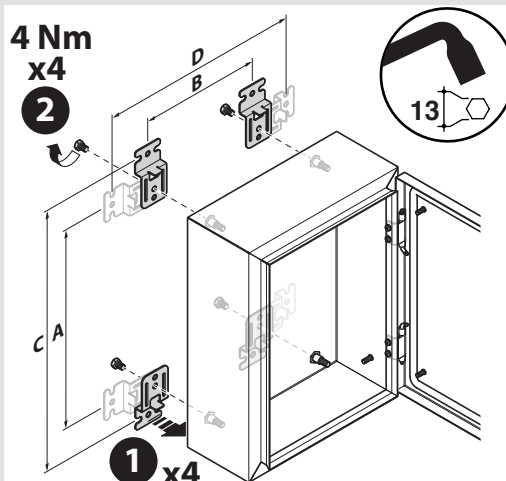

H	L	B	A	B1	A1	D	C
300	200	110	240			250	350
300	300	210	240			350	350
300	400	310	240			450	350
400	300	210	340			350	450
400	400	310	340			450	450
400	600	510	340			650	450
500	400	310	440			450	550
500	500	410	440			550	550
600	400	310	540			450	650
600	500	410	540			550	650
600	600	510	540			650	650
600	800	710	540			850	650
700	500	410	640			550	750
800	600	510	740			650	850
800	800	710	740			850	850


UZ020W x2

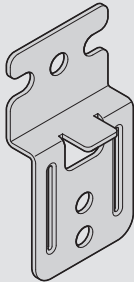


x 4



x 4

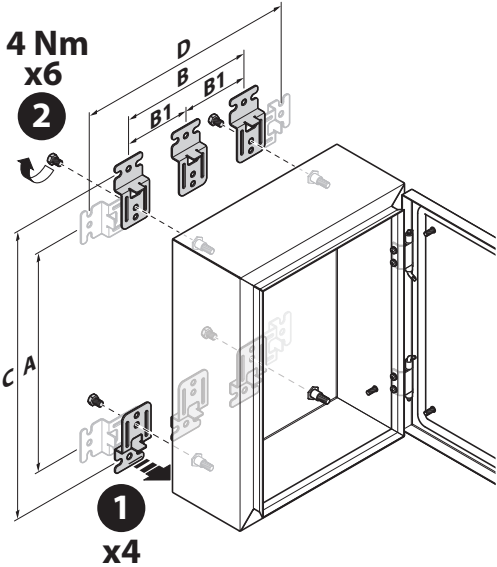


H	L	B	A	B1	A1	D	C
600	1000	910	540	455		1050	650
800	1000	910	740	455		1050	850
800	1200	1110	740	555		1250	850

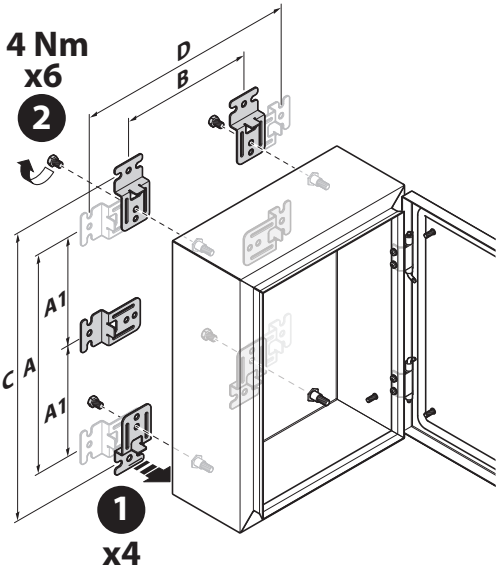

H	L	B	A	B1	A1	D	C
1000	600	510	940		470	650	1050
1000	800	710	940		470	850	1050
1200	600	510	1140		570	650	1250
1200	800	710	1140		570	850	1250
1400	800	710	1340		670	850	1450
1600	800	710	1540		770	850	1650


UZ020W x2

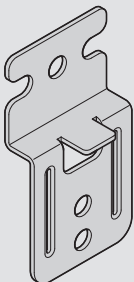

x 4








x 4

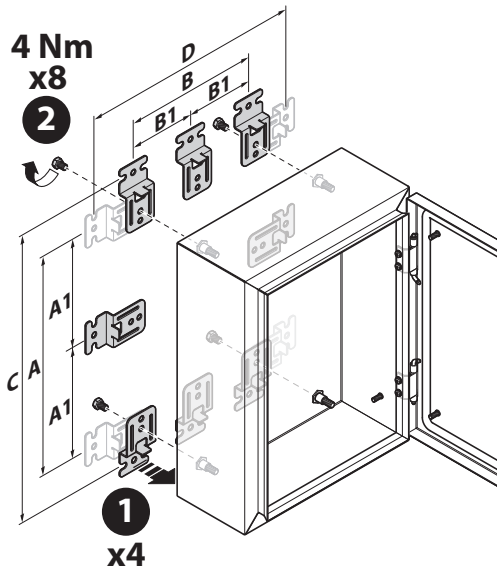

H	L	B	A	B1	A1	D	C
1000	1000	910	940	455	470	1050	1050
1200	1000	910	1140	455	570	1050	1250
1200	1200	1110	1140	555	570	1250	1250
1400	1000	910	1340	455	670	1050	1450
1400	1200	1110	1340	555	670	1250	1450



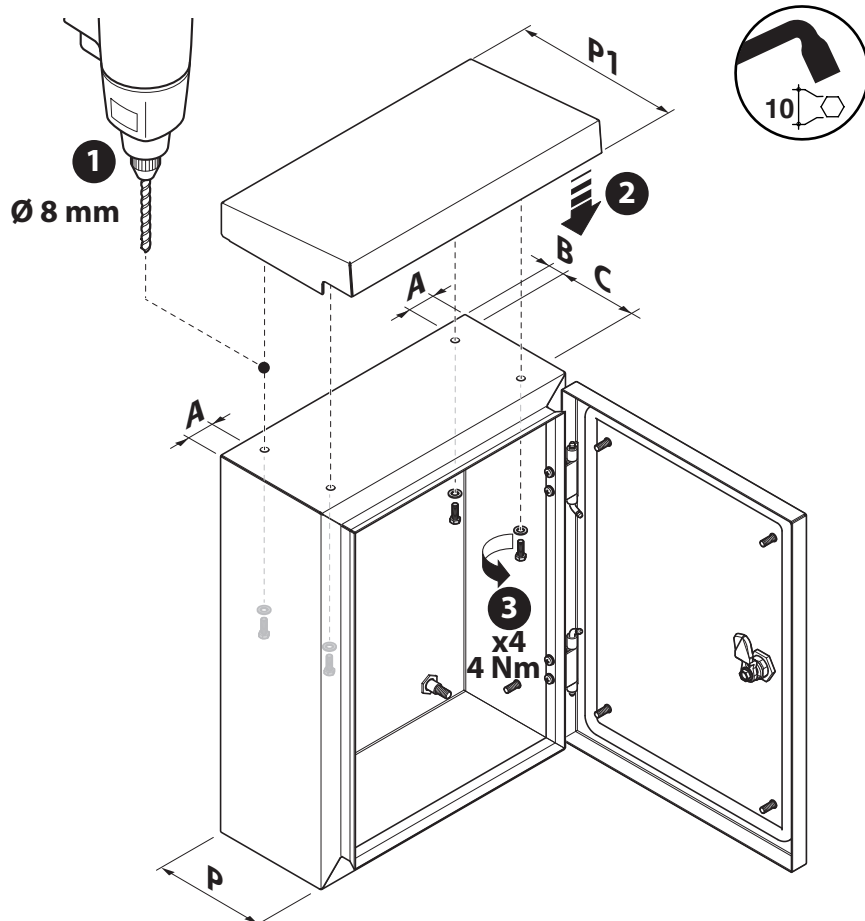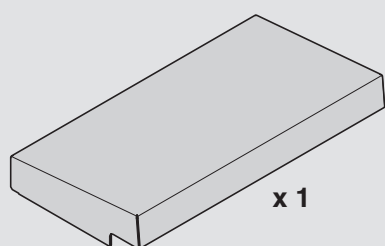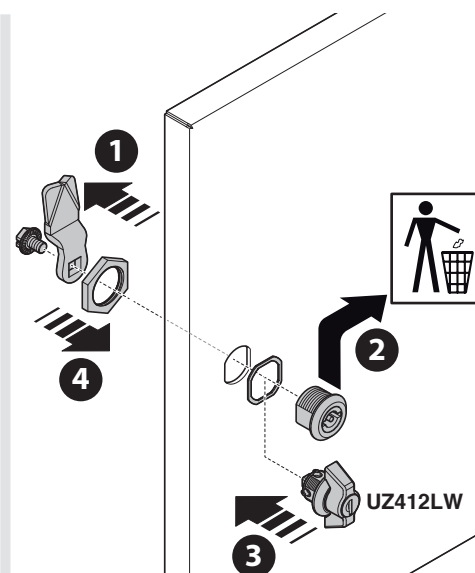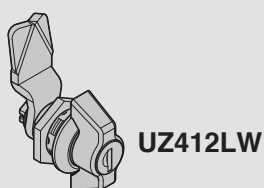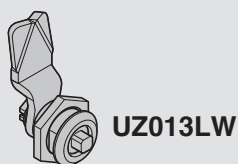

AISI 304	AISI 316	L	P	P1	A	B	C
FZ110CW	FZ110CWL	200	150	250	17,00	62,00	
FZ111CW	FZ111CWL	300	150	250	17,00	62,00	
FZ112CW	FZ112CWL	400	150	250	17,00	62,00	
FZ113CW	FZ113CWL	300	210	310	17,00	50,00	85,00
FZ114CW	FZ114CWL	400	210	310	17,00	50,00	85,00
FZ118CW	FZ118CWL	500	210	310	17,00	50,00	85,00
FZ120CW	FZ120CWL	600	210	310	17,00	50,00	85,00
FZ119CW	FZ119CWL	500	250	350	17,00	50,00	125,00
FZ121CW	FZ121CWL	600	250	350	17,00	50,00	125,00
FZ122CW	FZ122CWL	600	300	400	17,00	50,00	175,00
FZ124CW	FZ124CWL	800	300	400	17,00	50,00	175,00
FZ126CW	FZ126CWL	1000	300	400	17,00	50,00	175,00
FZ128CW	FZ128CWL	1200	300	400	17,00	50,00	175,00