 


 
 

UZ02LES

- Ⓒ GB Mounting instructions
- Ⓒ FR Notice d'instructions
- Ⓒ DE Montageanleitung
- Ⓒ NL Montage instructie
- Ⓒ DK Monteringsvejledning
- Ⓒ FI Asennusohje
- Ⓒ NO Montasjeanvisning
- Ⓒ SE Monterings instruktioner
- Ⓒ IT Istruzioni di montaggio
- Ⓒ ES Instrucciones de montaje
- Ⓒ PT Instruções de montagem
- Ⓒ CZ Montážní návod
- Ⓒ BA Uputstvo za montažu
- Инструкції з установки

 
- Ⓒ HR Upute za montažu
- Ⓒ HU Szerelési útmutató
- Ⓒ LT Montavimo instrukcija
- Ⓒ LV Montāžas instrukcija
- Ⓒ PL Instrukcja montażowa
- Ⓒ RO Instrucțiuni de montare
- Ⓒ SK Návod na montáž
- Ⓒ RU Указания по установке
- Ⓒ BG Инструкции за монтаж
- Ⓒ GR ---
- Ⓒ SI Navodilo za montažo
- Ⓒ EE Paigaldusjuhised
- Ⓒ IS Leiðbeiningar
- Ⓒ AR ---


UZ02LES


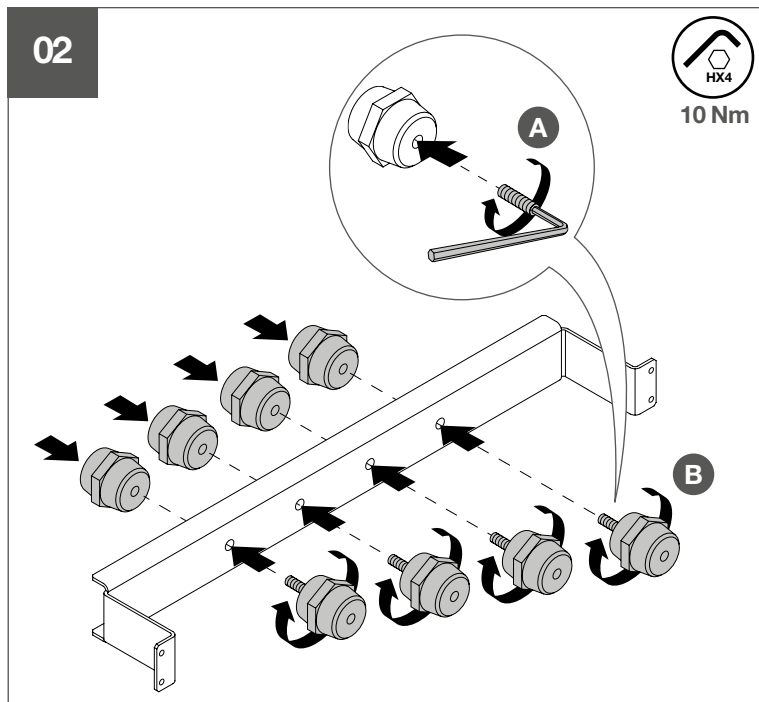
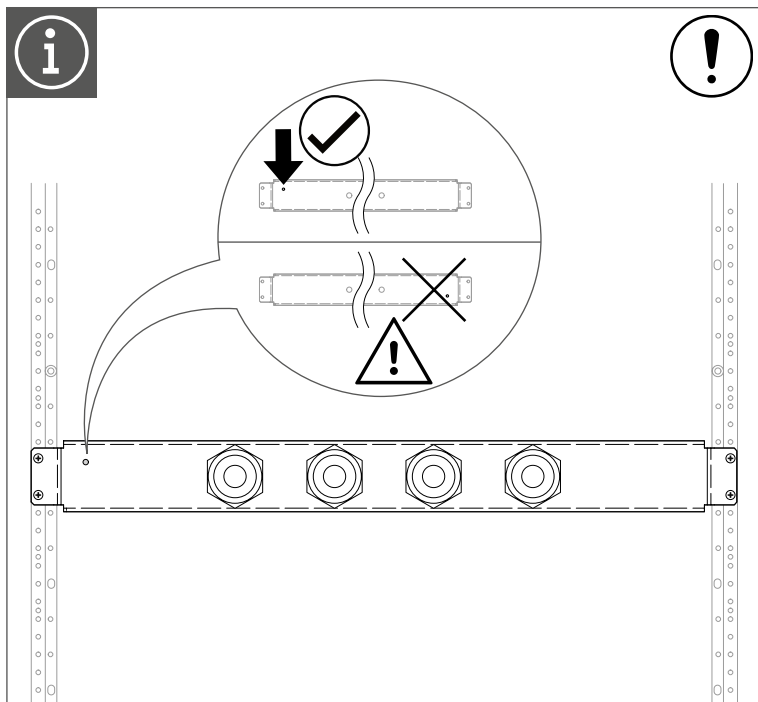
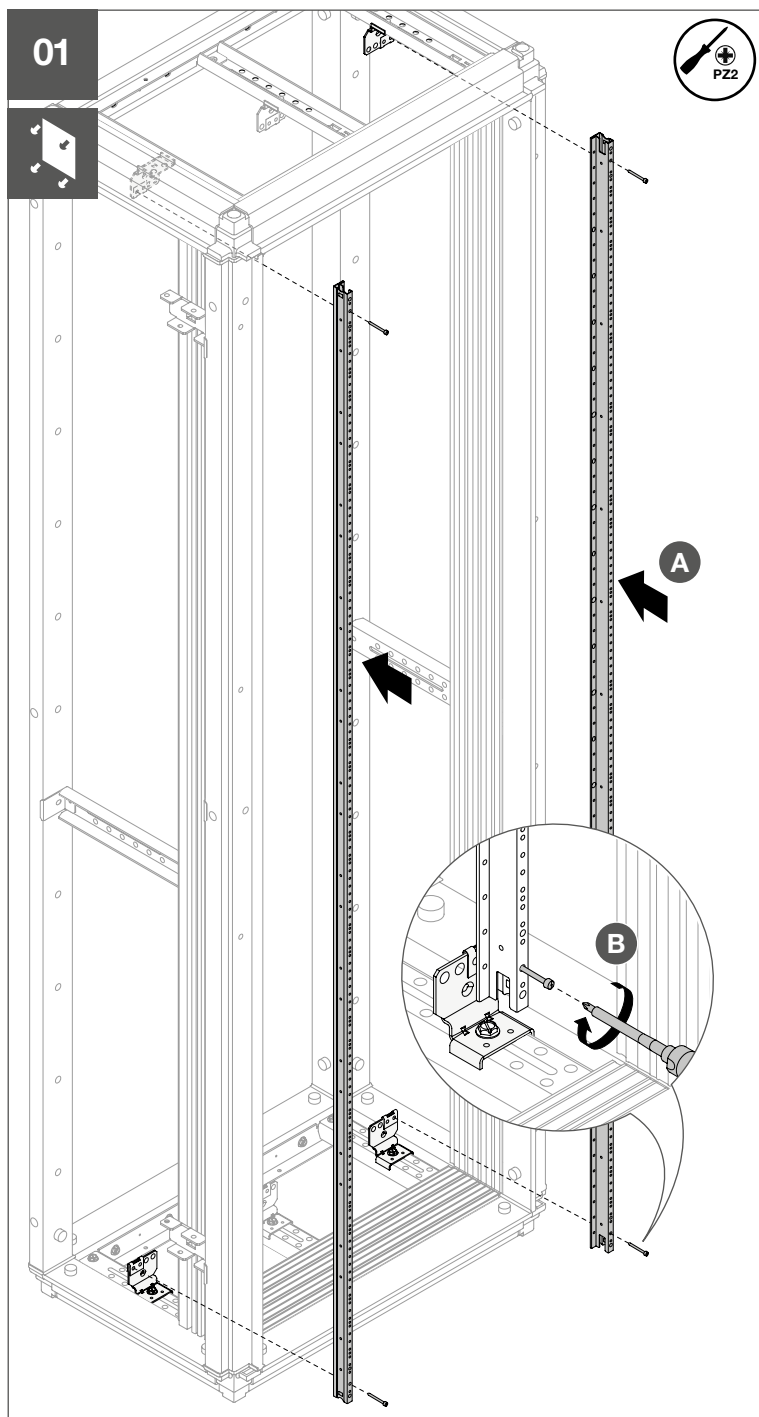
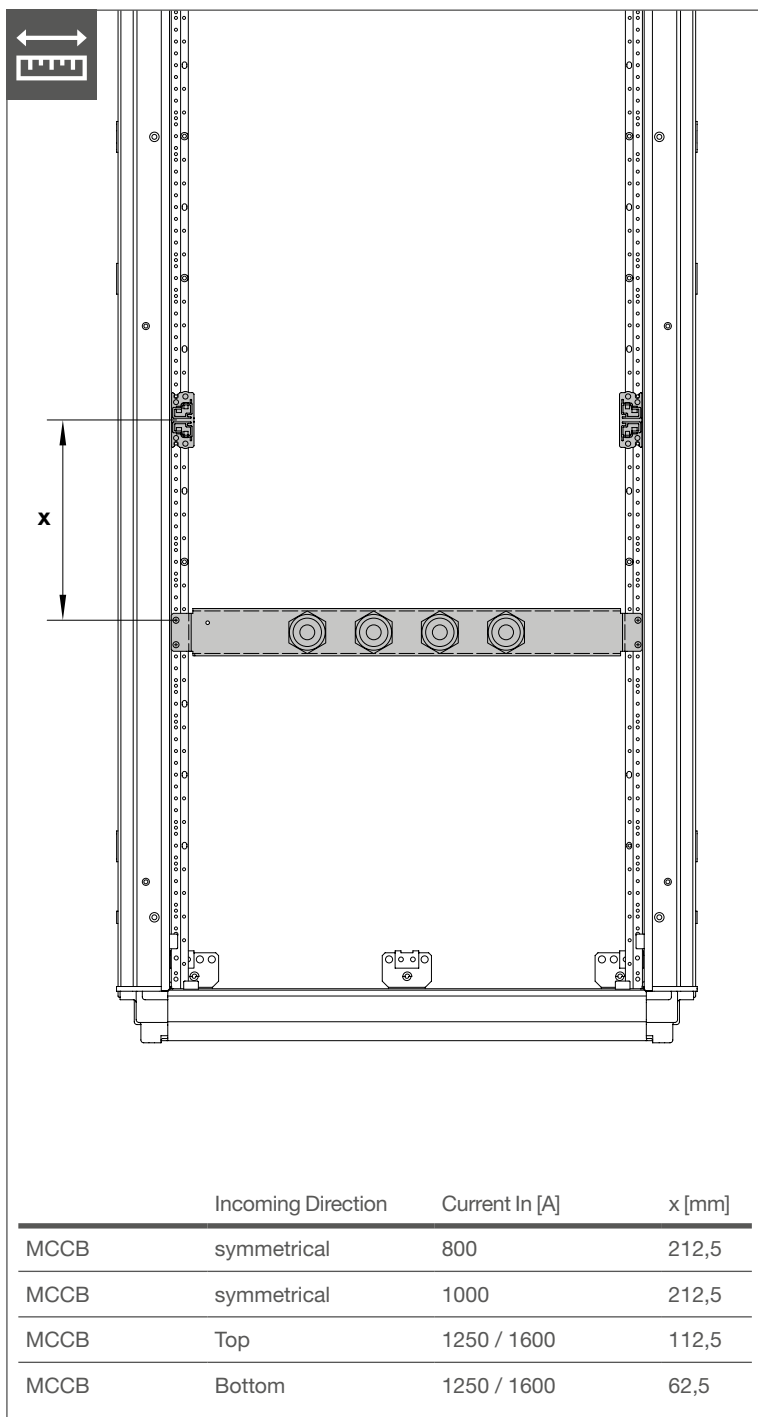
SW 13
SW 17
SW 19



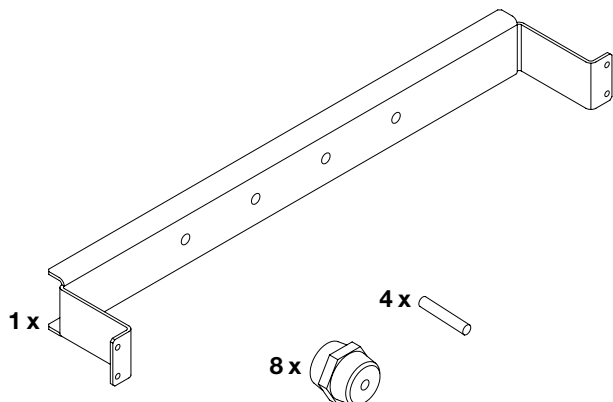
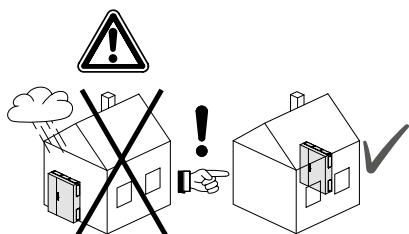




PZ 2




HX 4



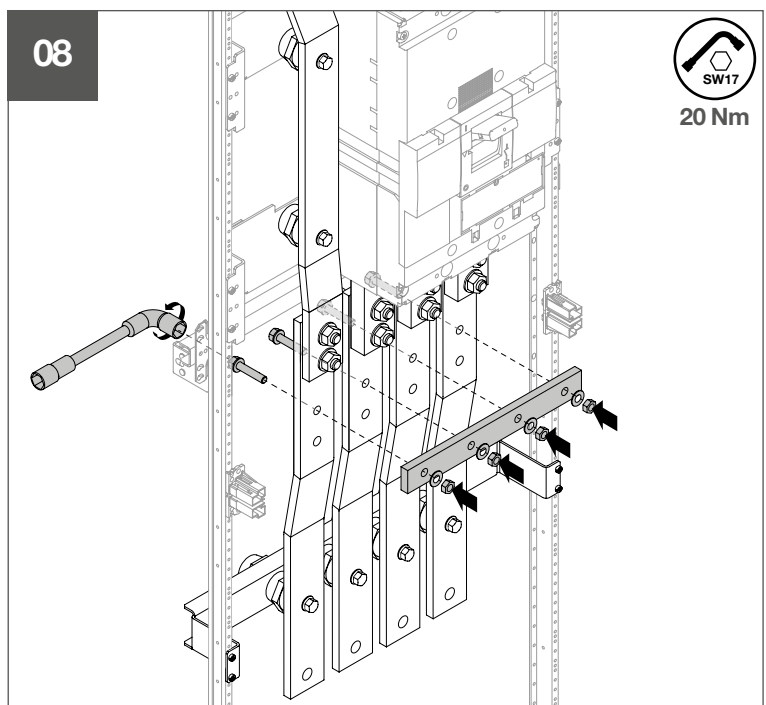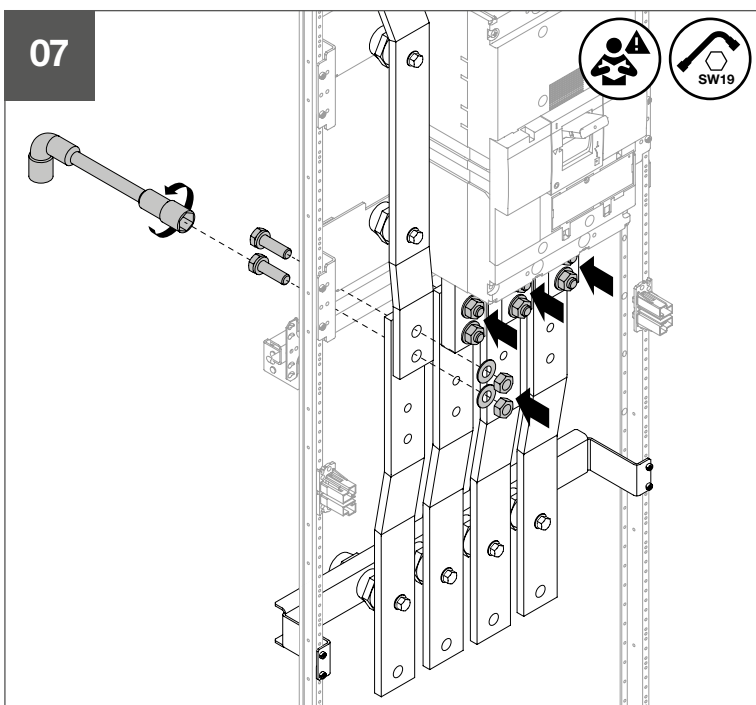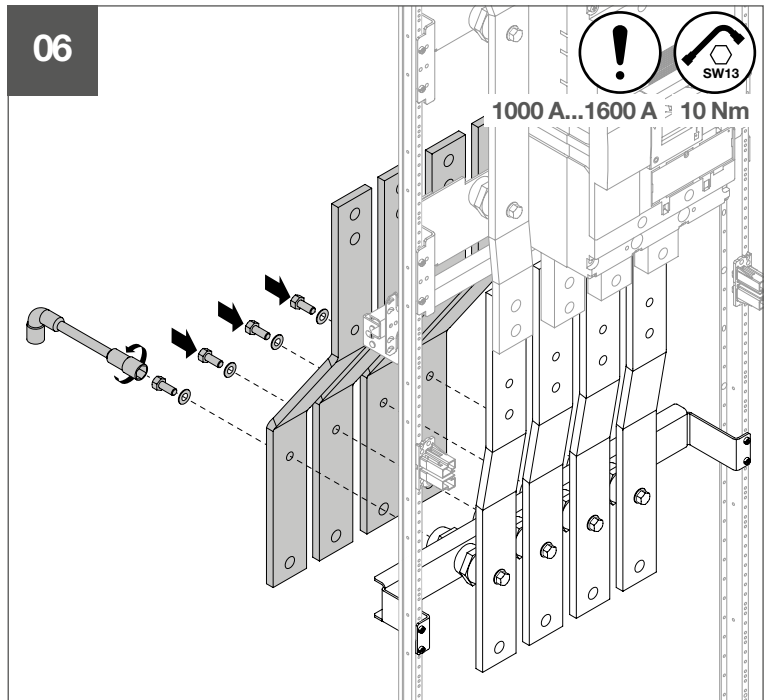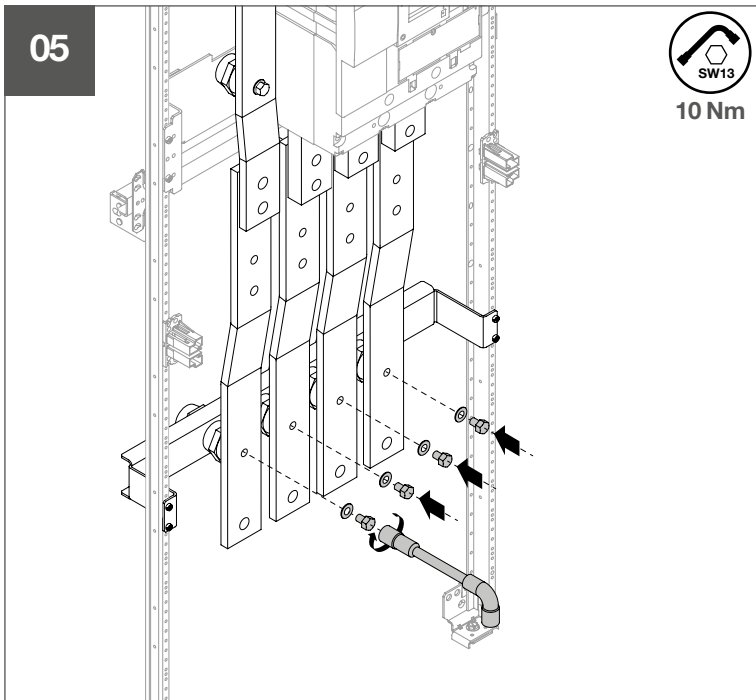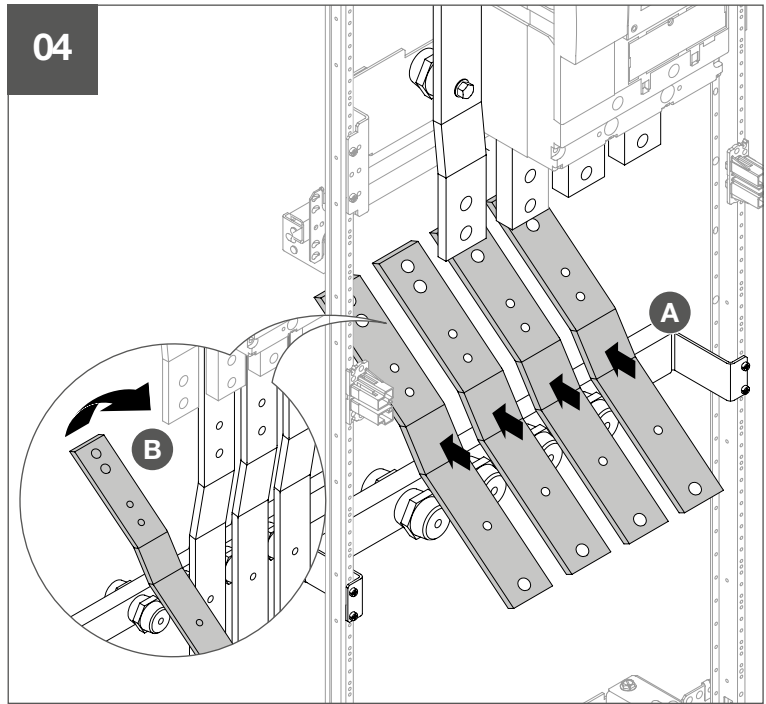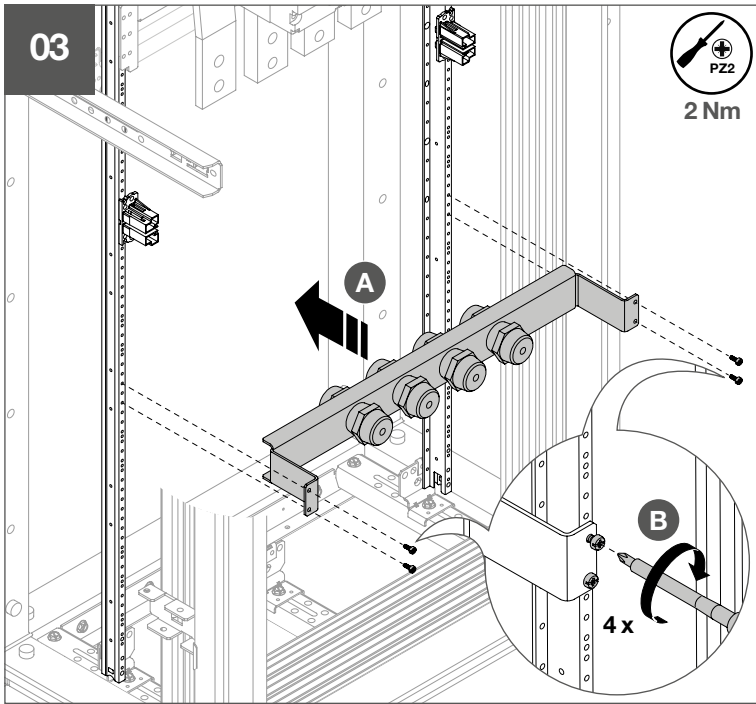

08a

800 A

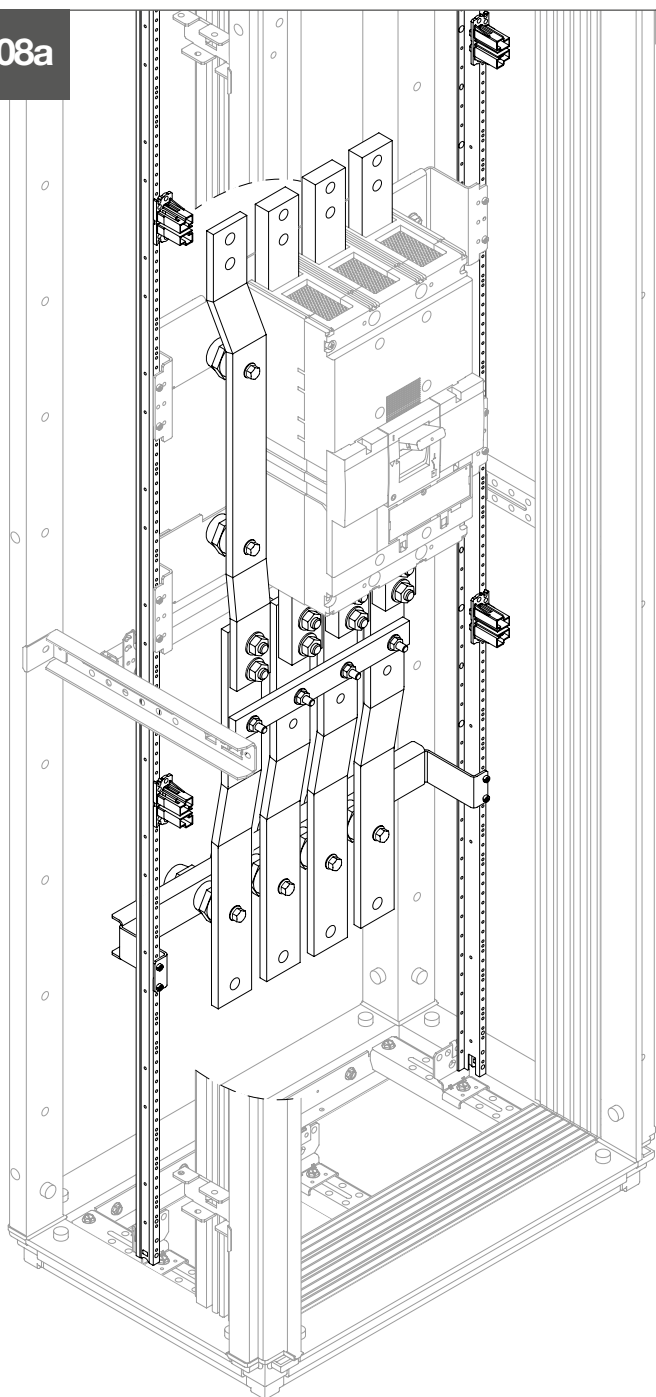

08b

1000 A...1600 A

