
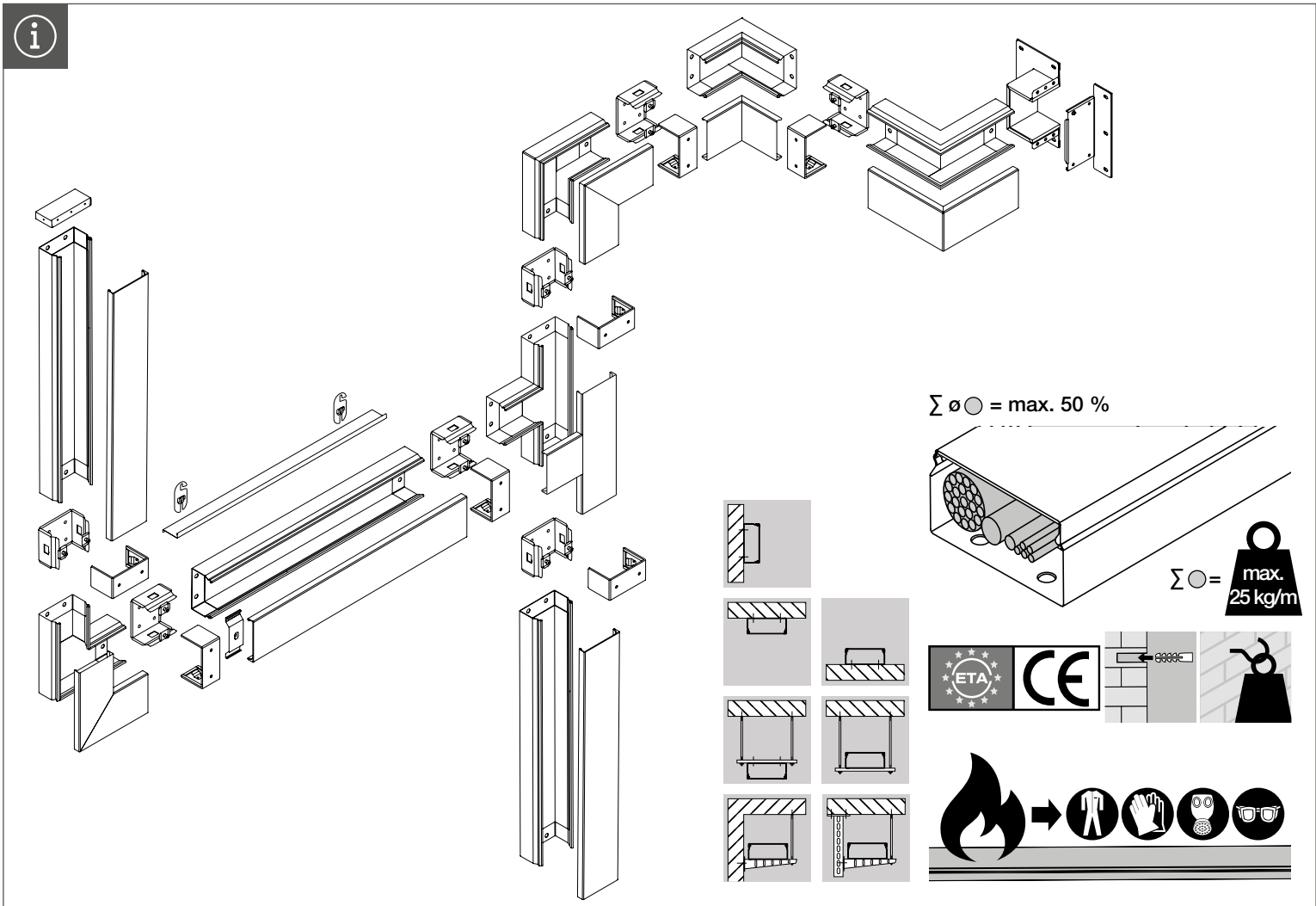
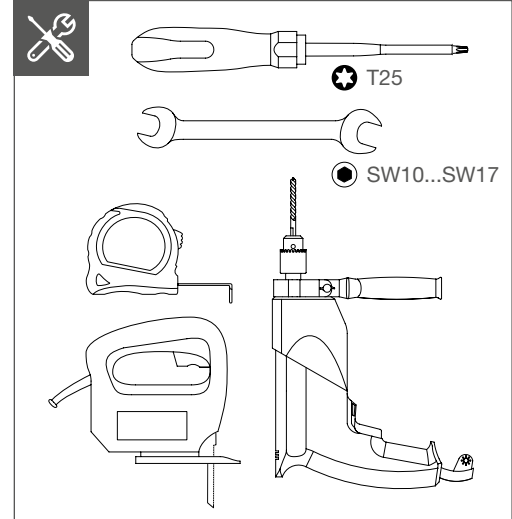
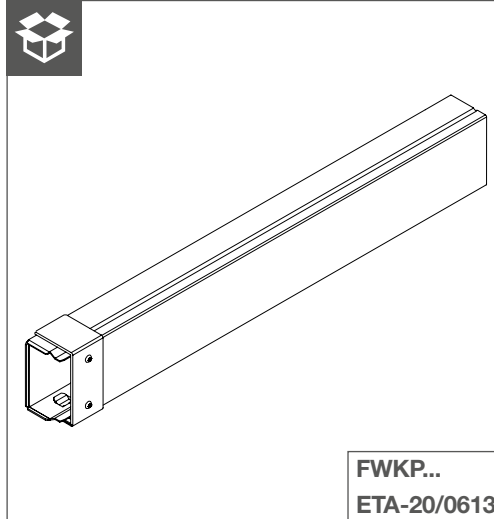



tehalit.FWK Plus

- (EN) Mounting instructions
- (FR) Notice d'instructions
- (DE) Montageanleitung
- (NL) Montage instructie
- (DA) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SV) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CS) Montážní návod
- (BS) Uputstvo za montažu
- (UK) Інструкції з установки


- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Montāžas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Указания по установке
- (BG) Инструкции за монтаж
- (EL) Οδηγίες τοποθέτησης
- (SL) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar
- (AR) دليل التركيب

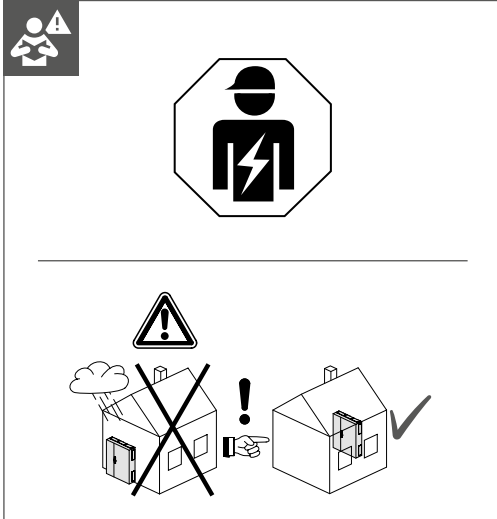


01

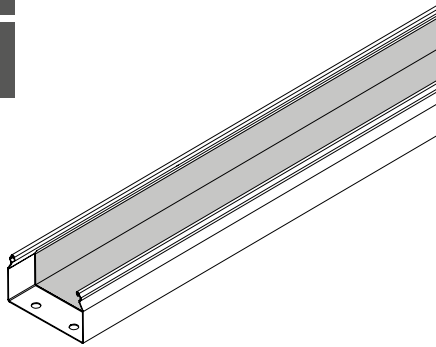



02

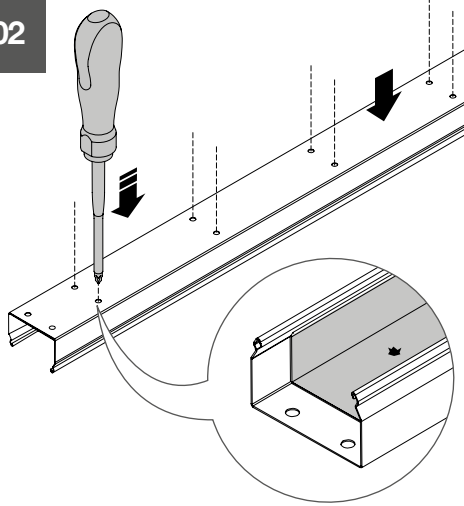


01

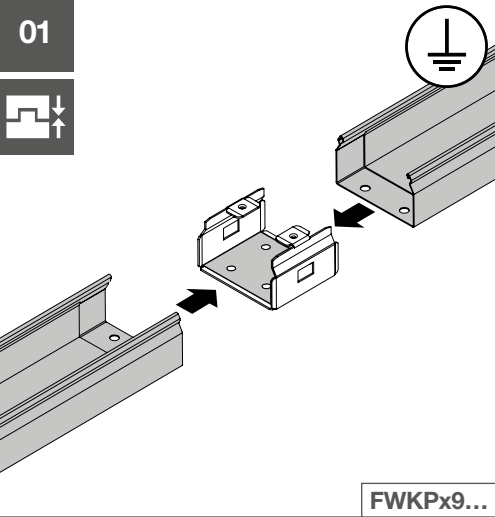


02








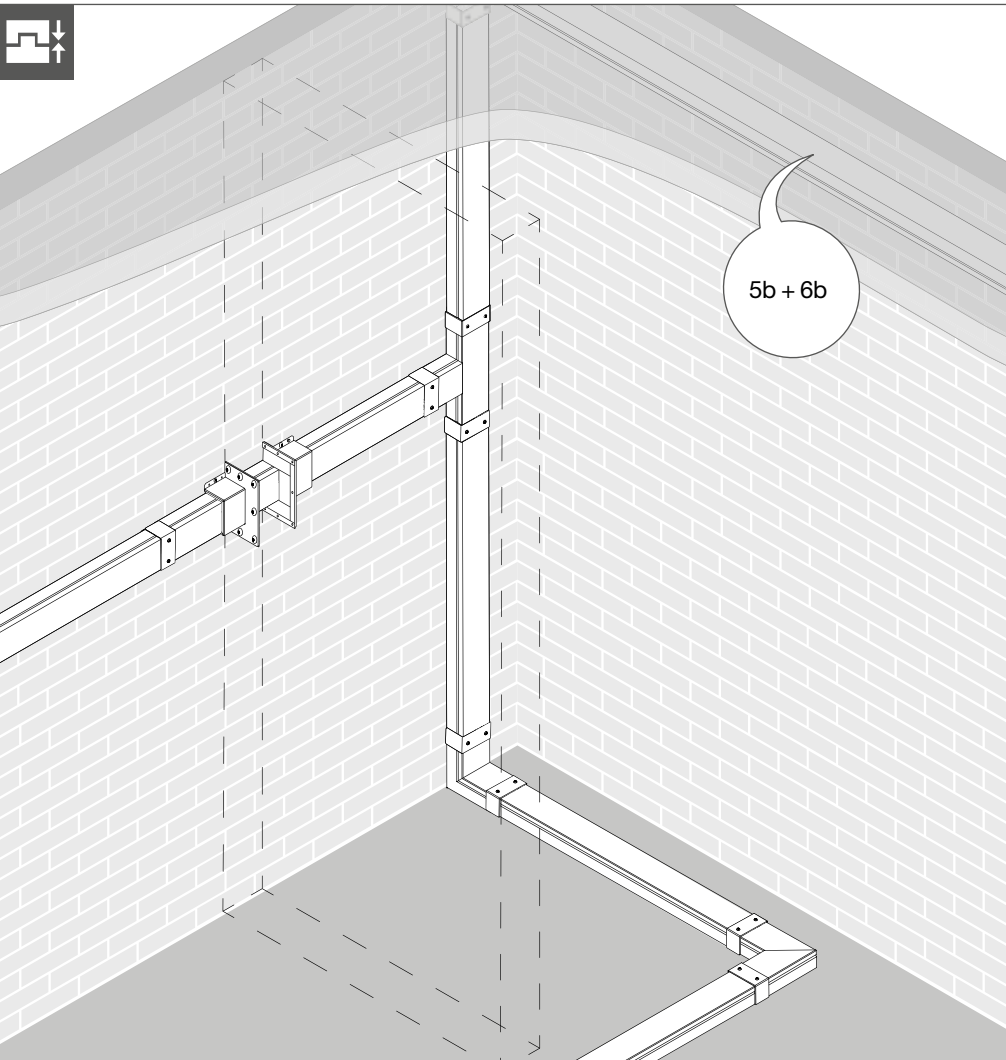
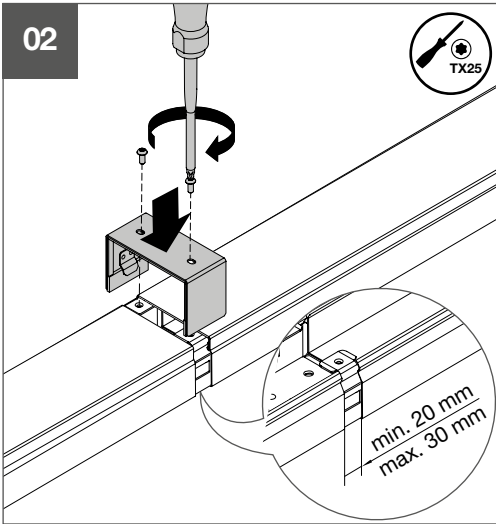













01



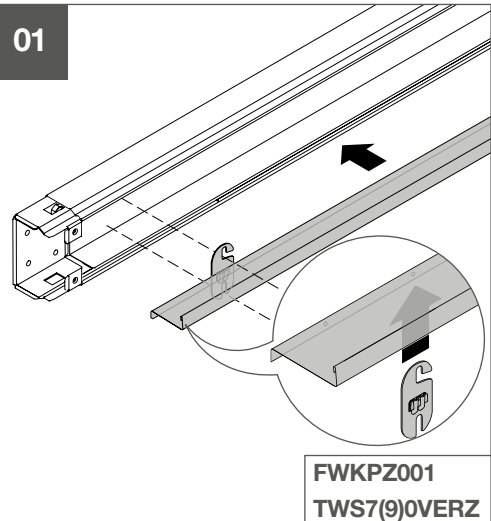


02

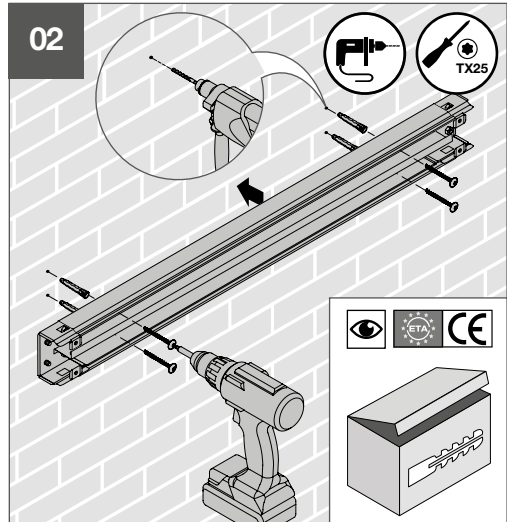

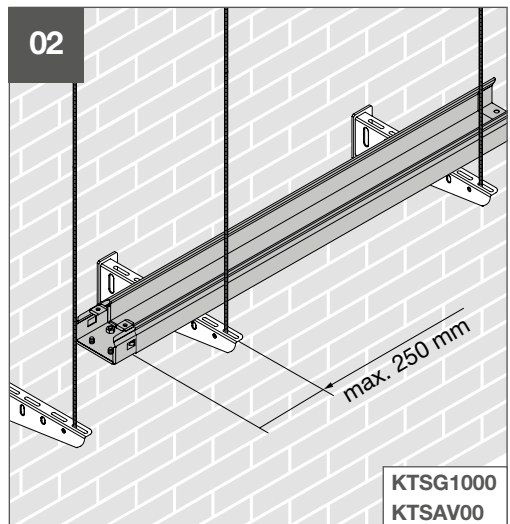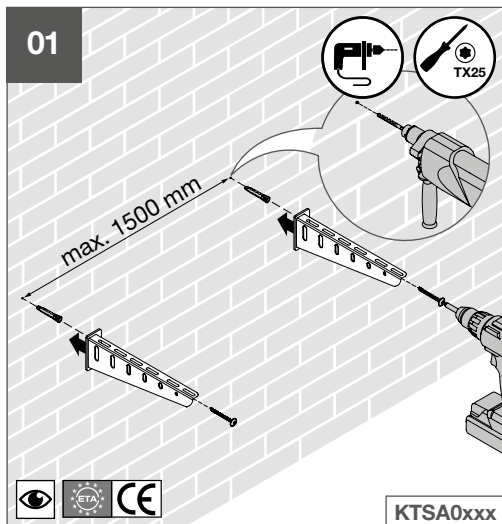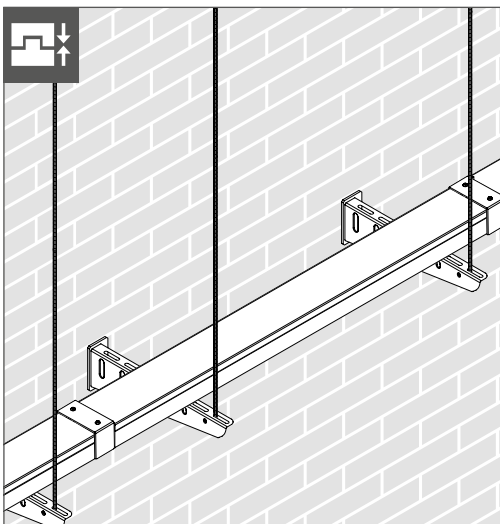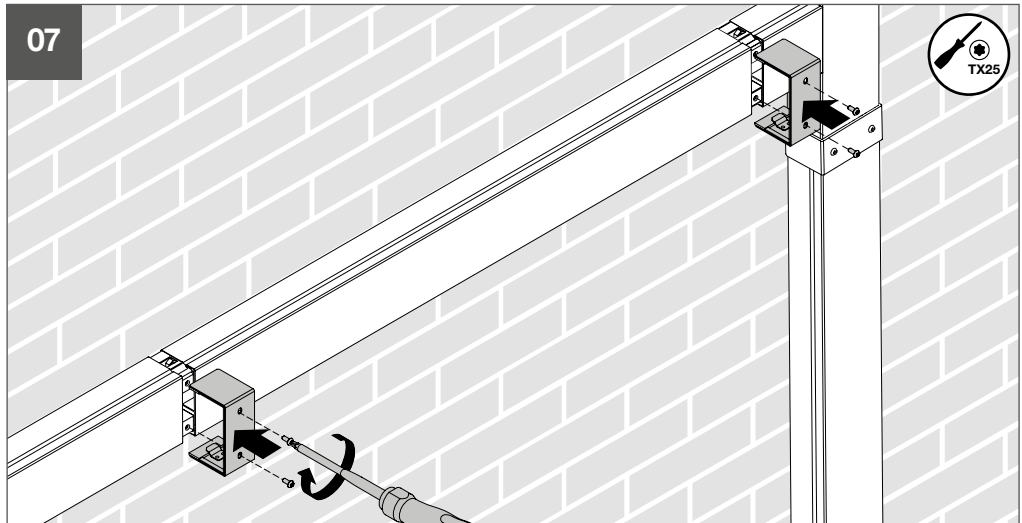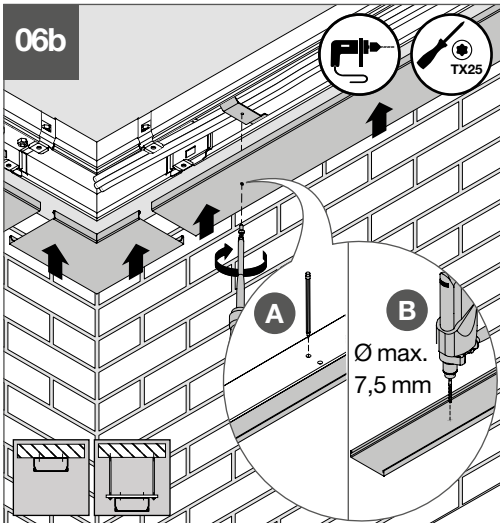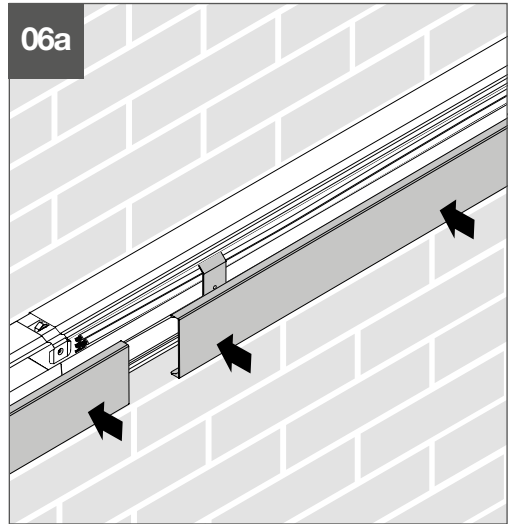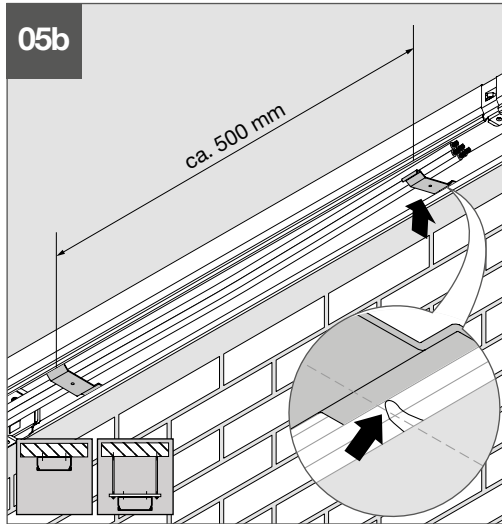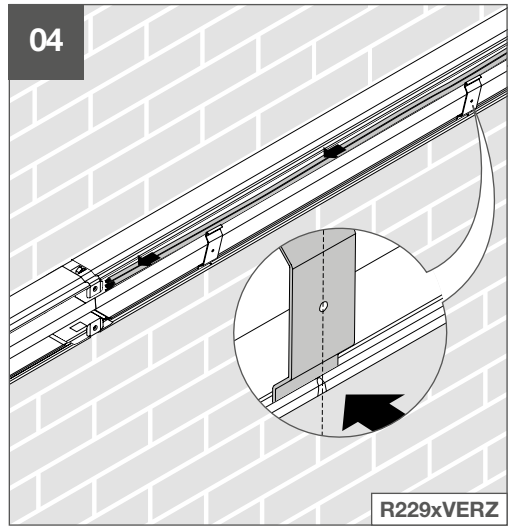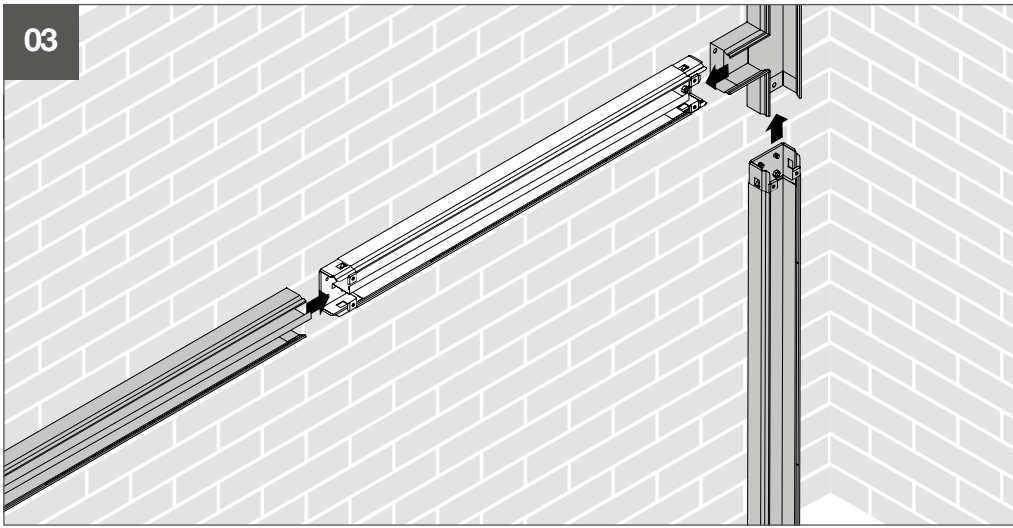

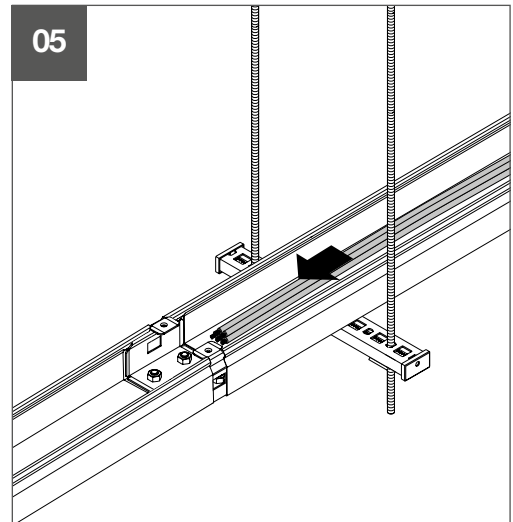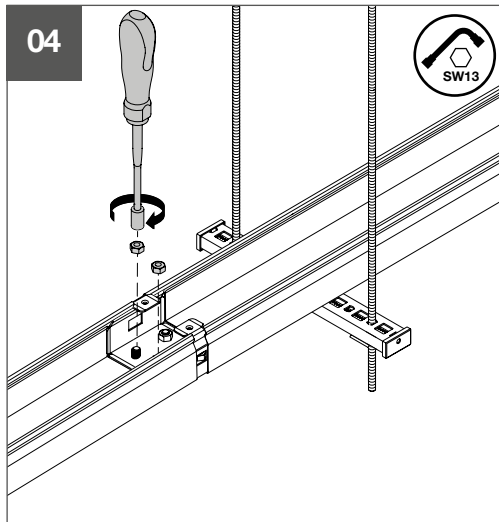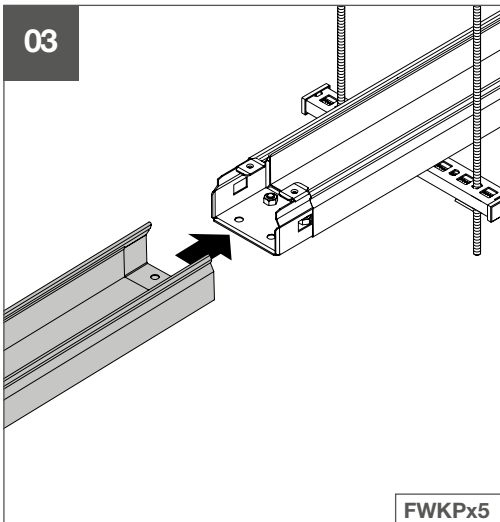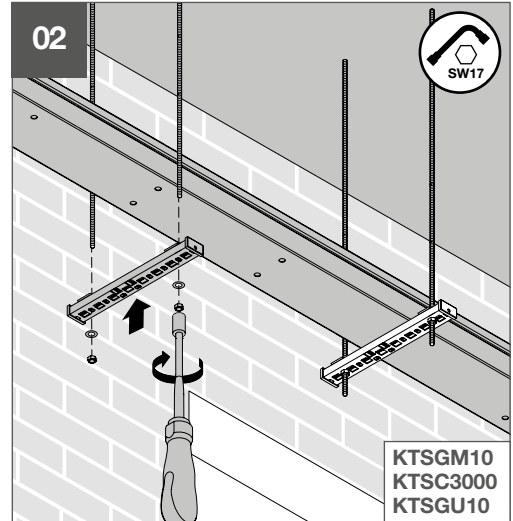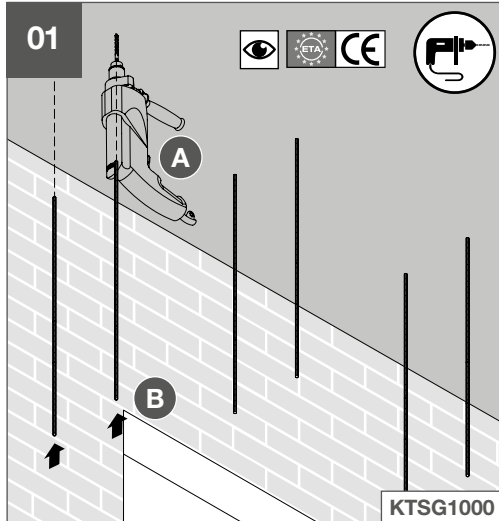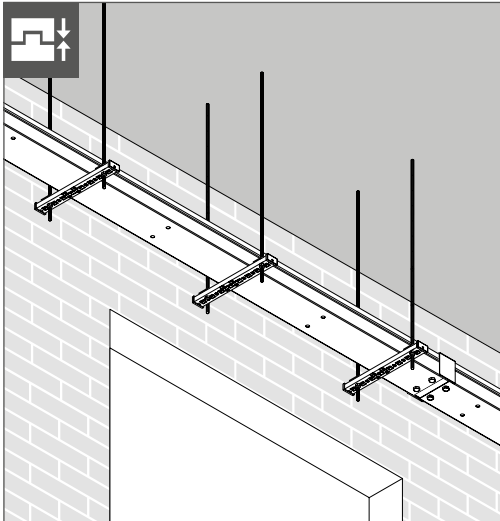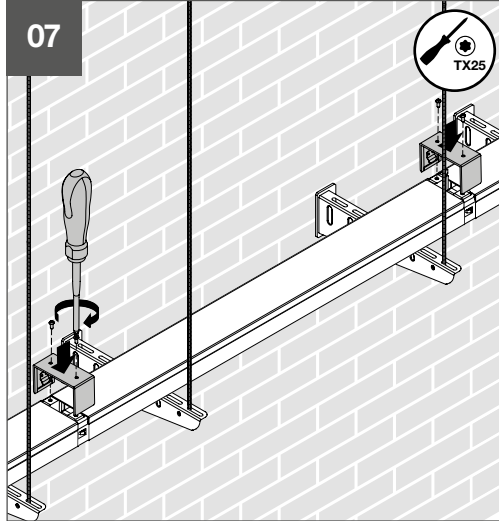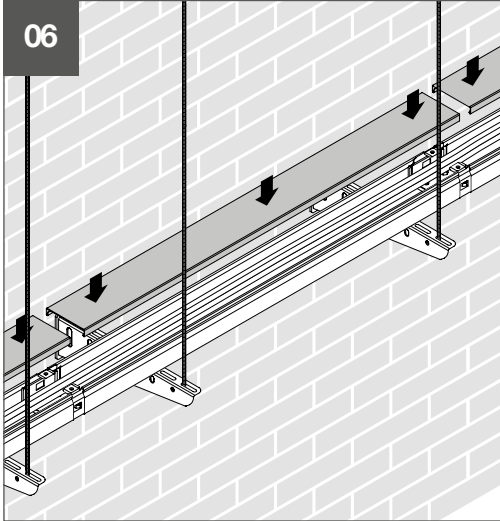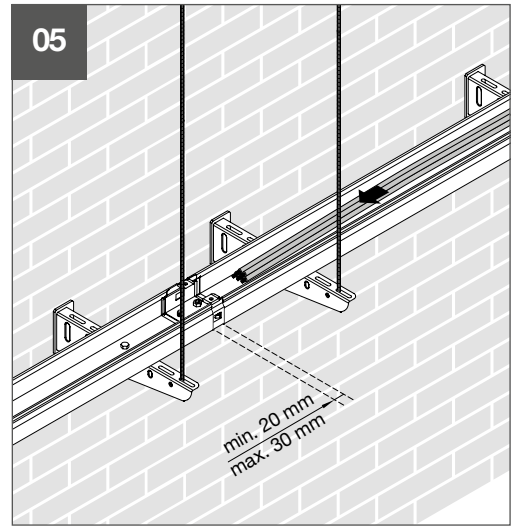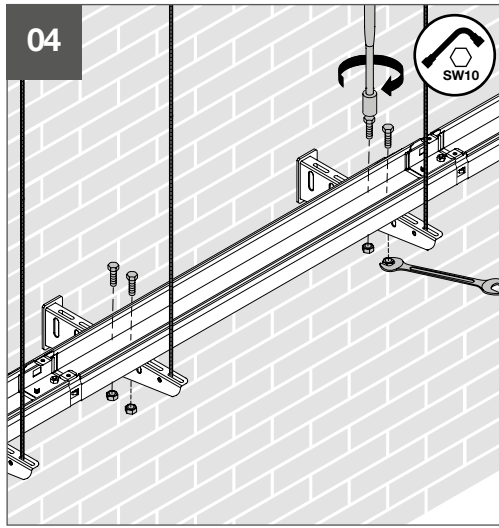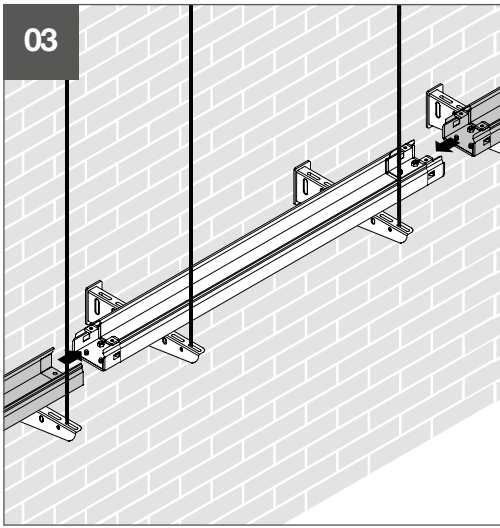

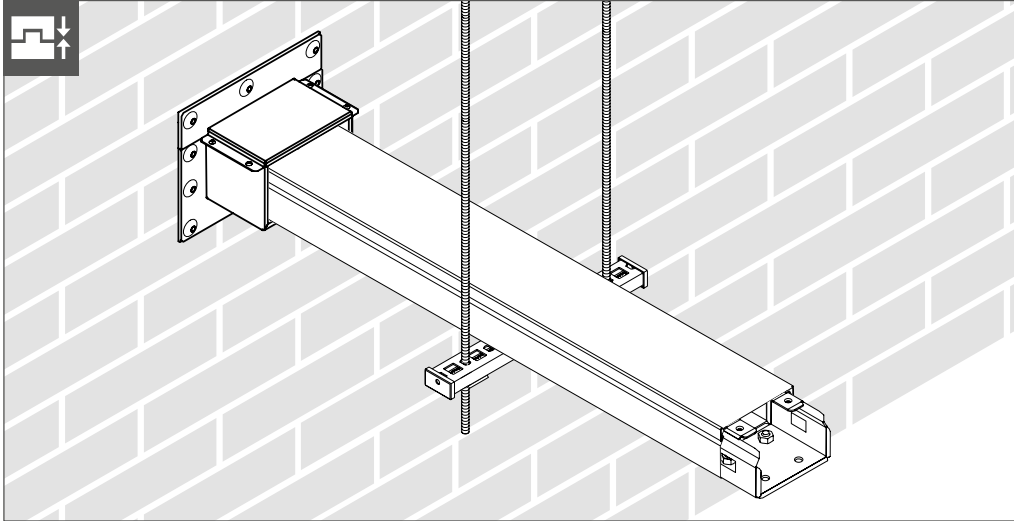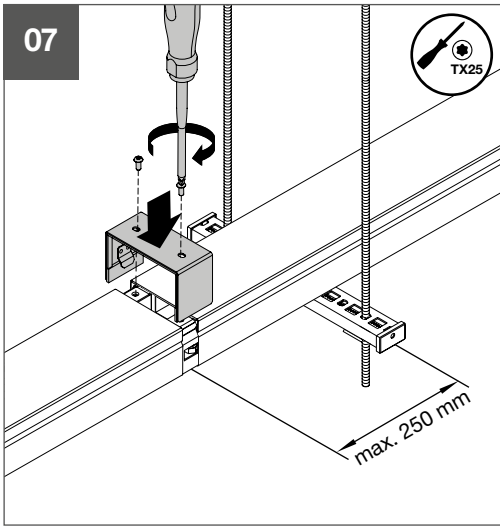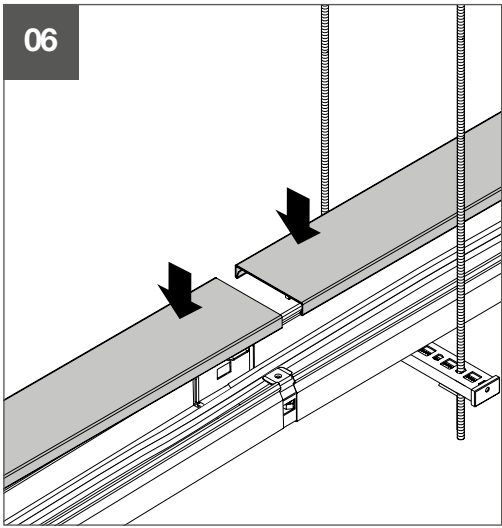







BSM*


BS90*

BSS*/ BSP*


Mineral wool (Mineralwolle):
FP > 1000°C, $\rho > 100 \text{ kg/m}^3$

Cement-/ Gypsum-mortar
(Zement-/ Gipsmörtel)

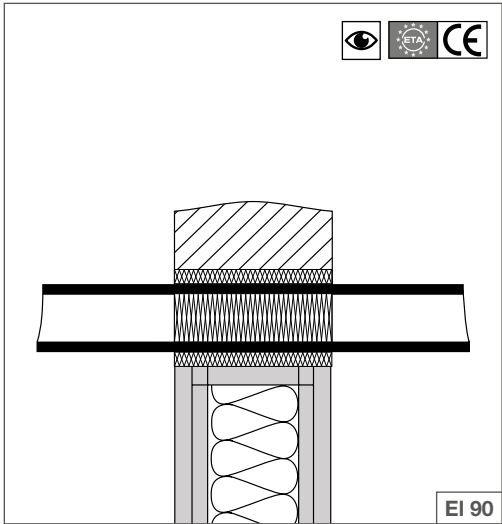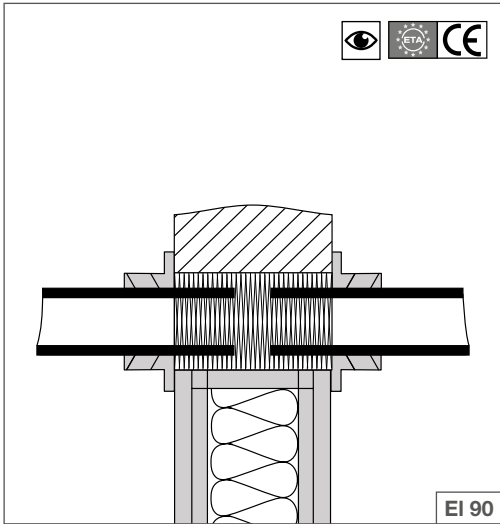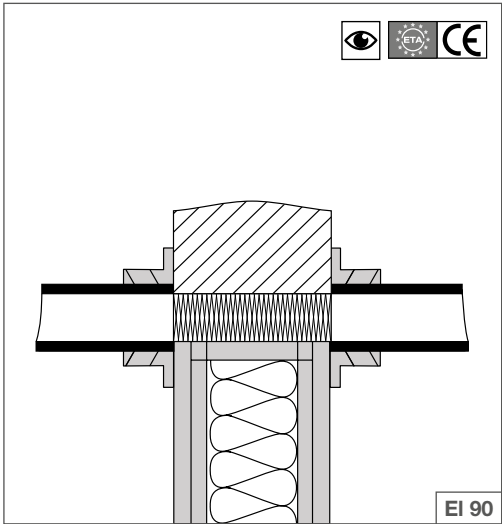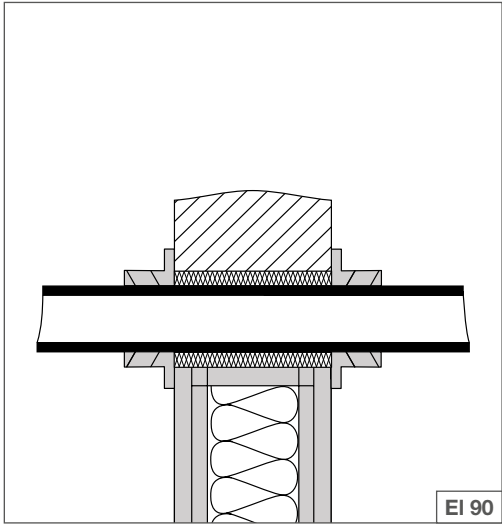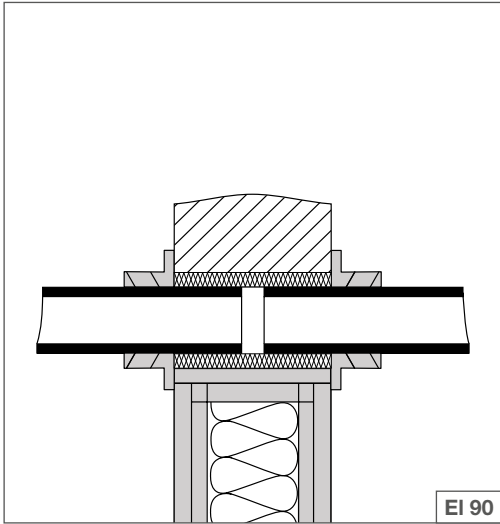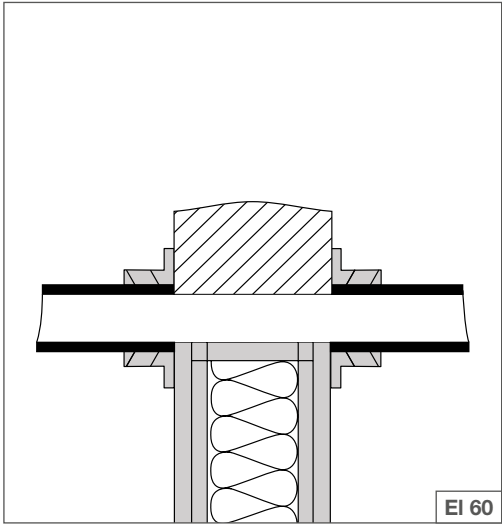


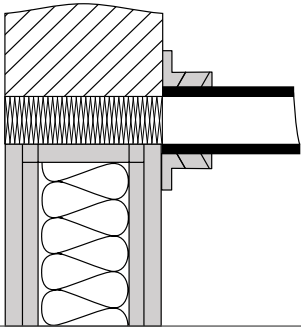


EI 90

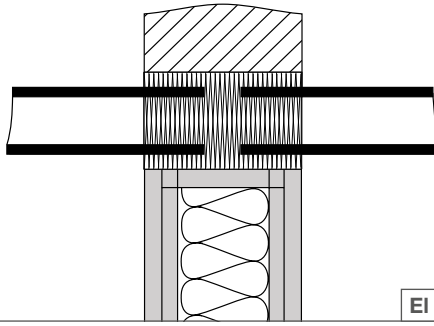


EI 90

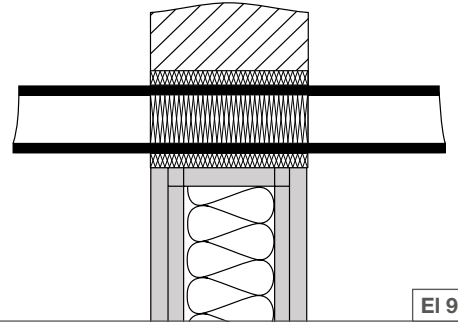


EI 90

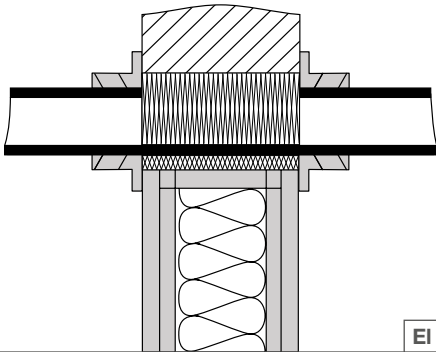

EI 90

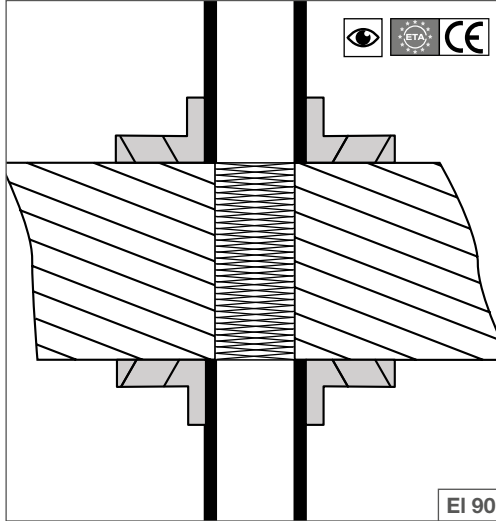


EI 90

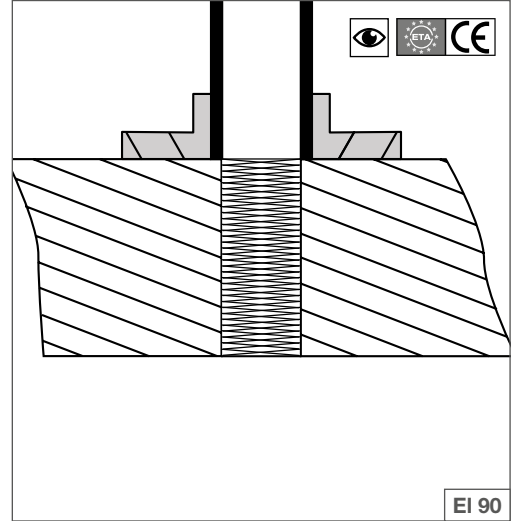


EI 90

01

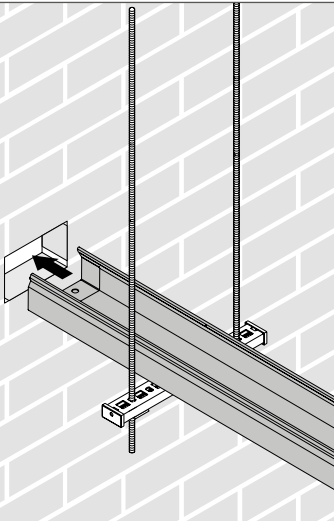


02

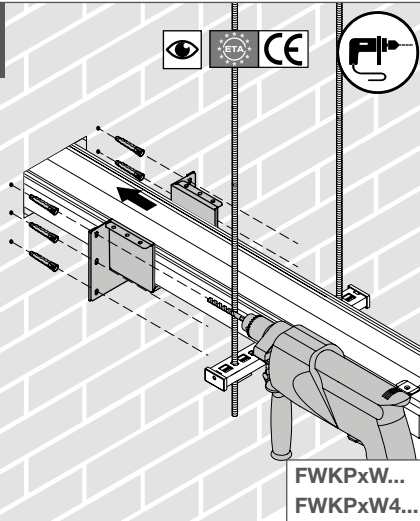


FWKPxW...
FWKPxW4...


03

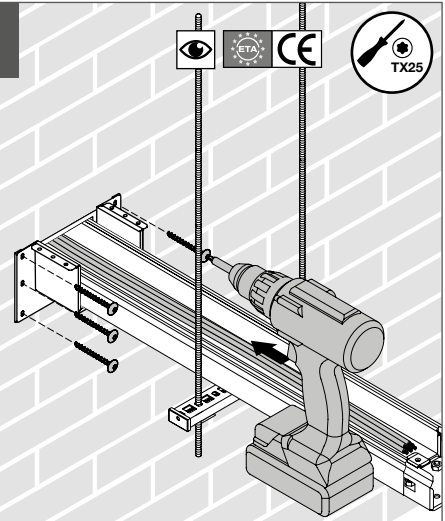


04













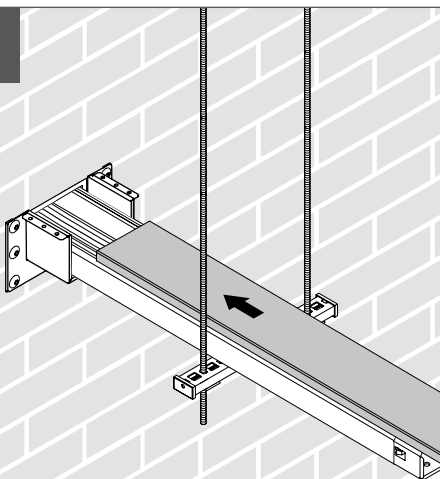



05

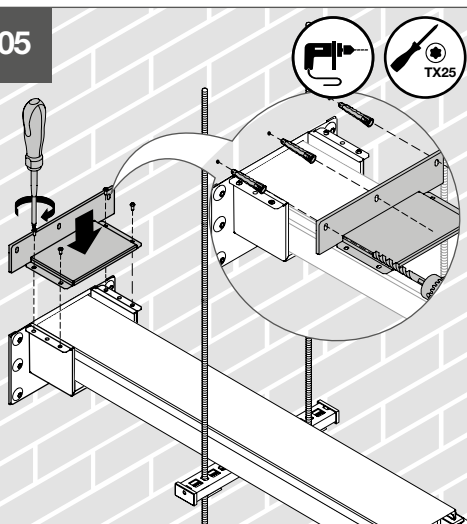

06

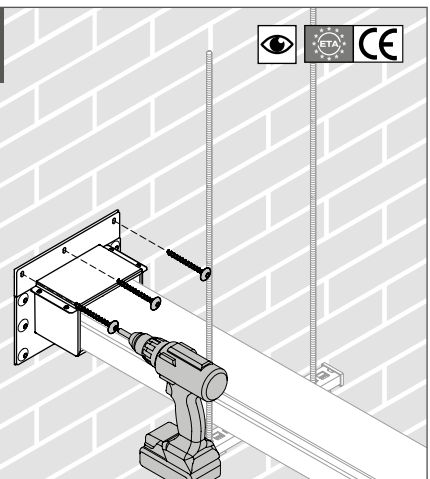

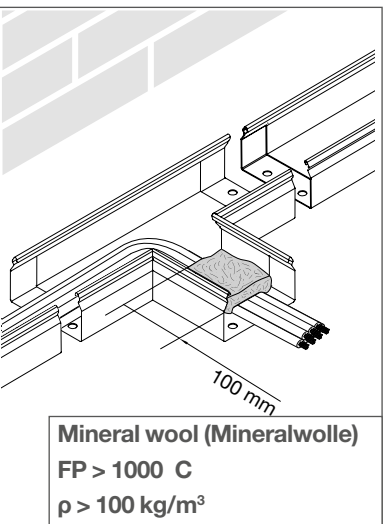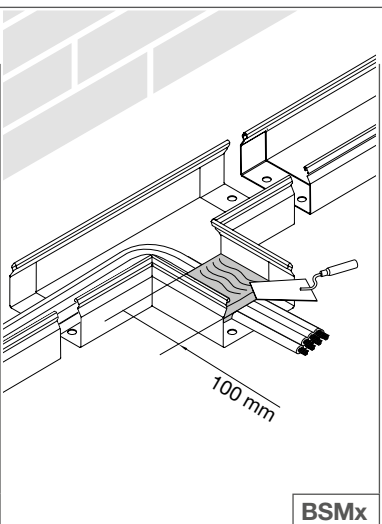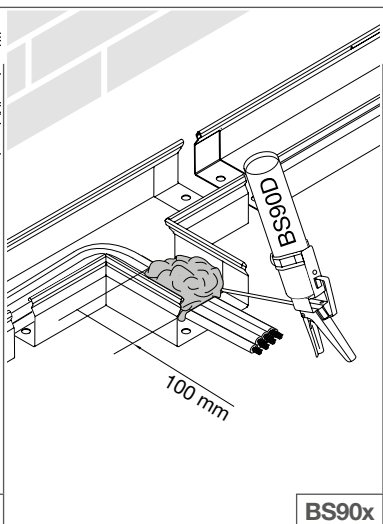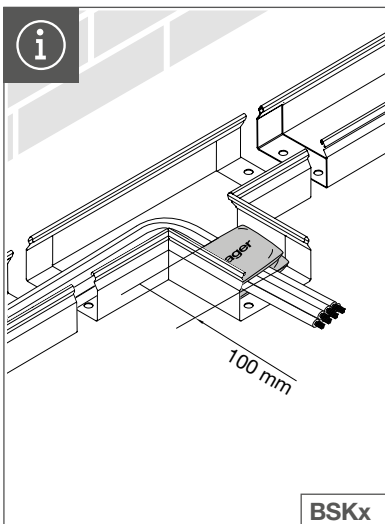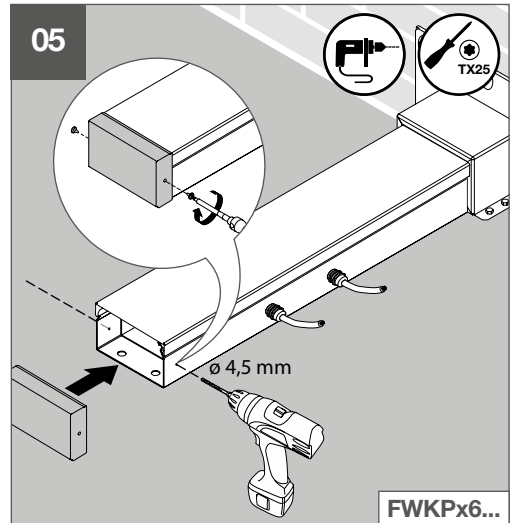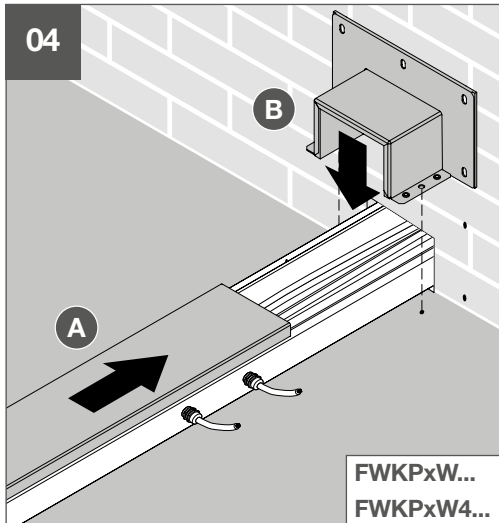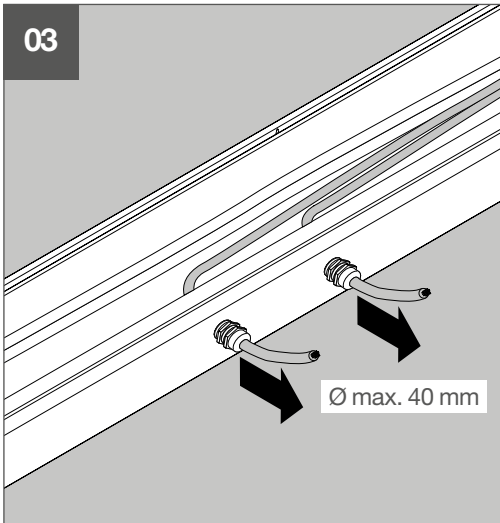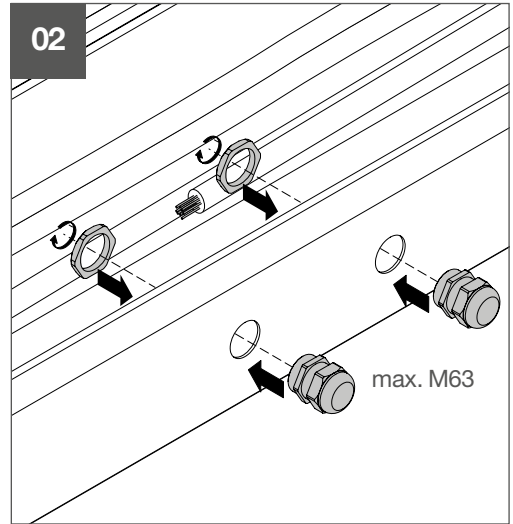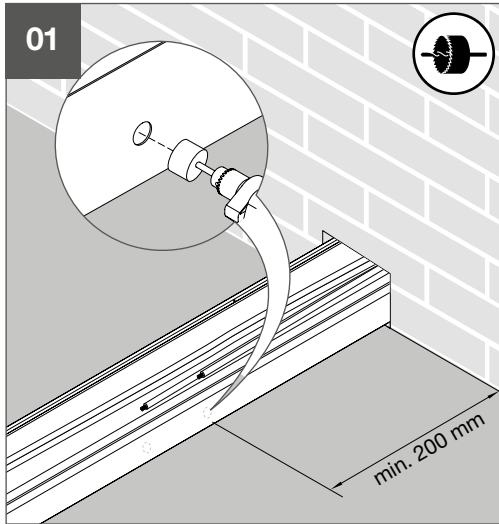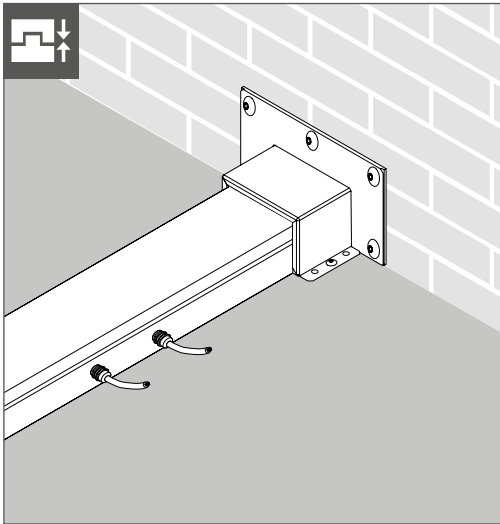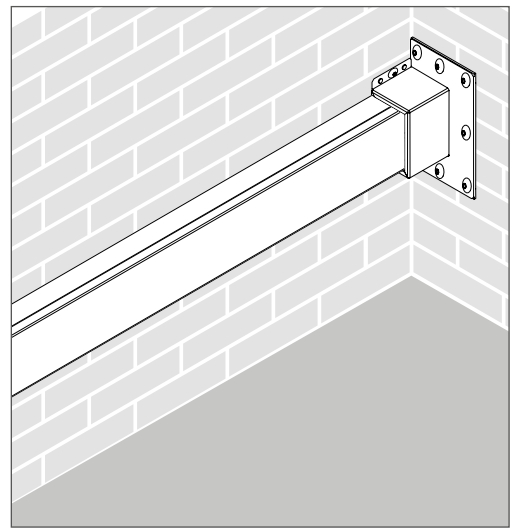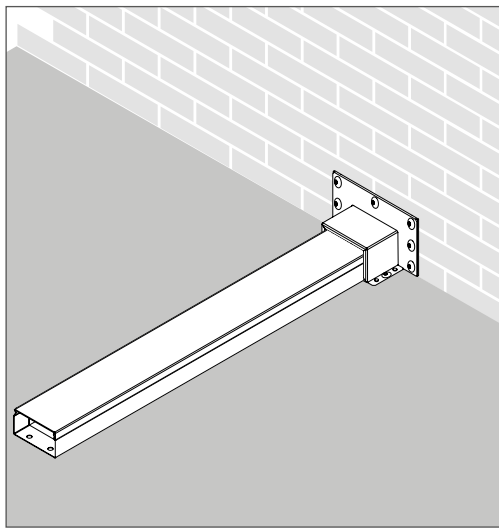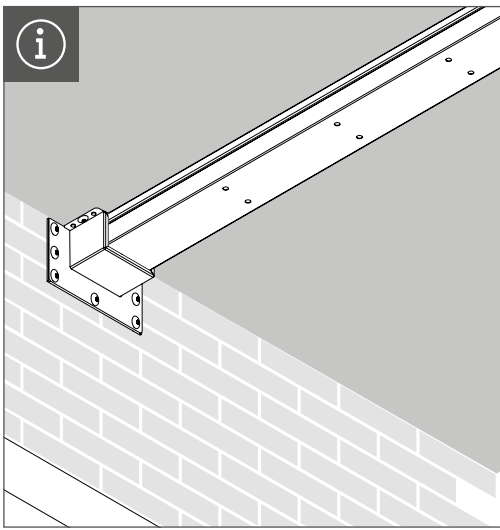

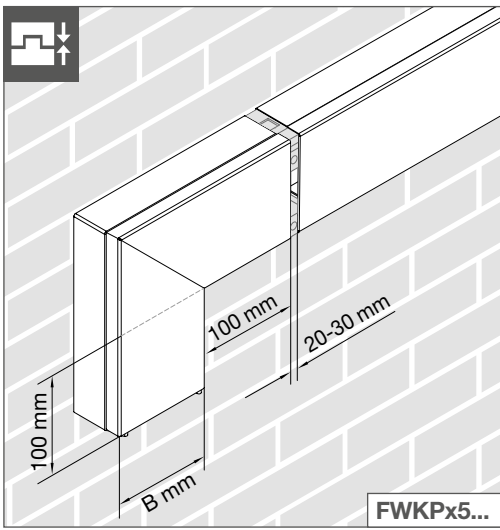

FWKPx5...

