
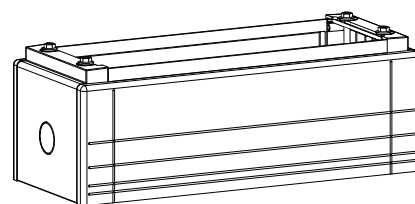
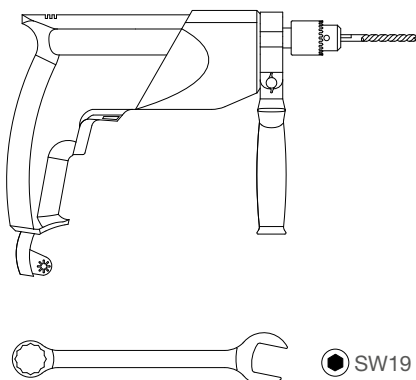





ZAX015E, ZAX016E, ZAX203E

- (EN) Mounting instructions
- (FR) Notice d'instructions
- (DE) Montageanleitung
- (NL) Montage instructie
- (DA) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SV) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CS) Montážní návod
- (BS) Uputstvo za montažu
- (UK) Інструкції з установки


- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Montāžas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Указания по установке
- (BG) Инструкции за монтаж
- (EL) Οδηγίες τοποθέτησης
- (SL) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar
- (AR) دليل التركيب

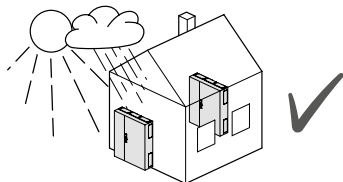

	a [mm]	b [mm]	c [mm]
ZAX015E	250	785	320
ZAX016E	250	1115	320
ZAX203E	250	1445	320

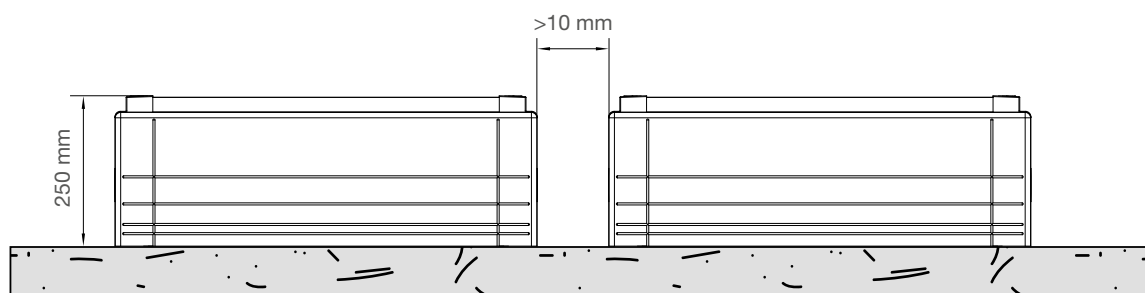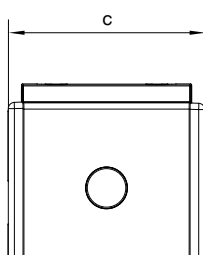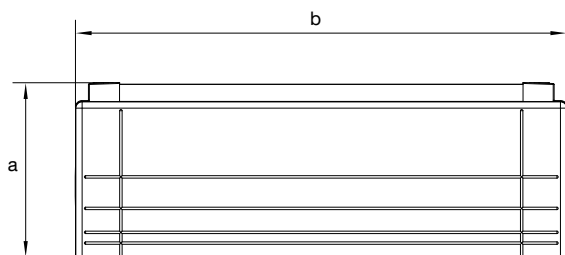


ZAX015E

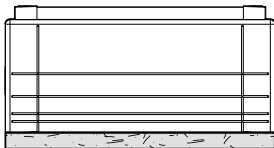


ZAX016E




ZAX203E

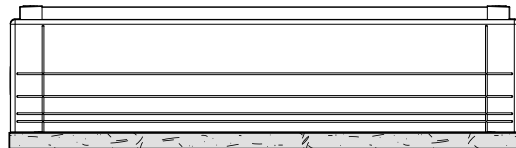


Ø 13 mm

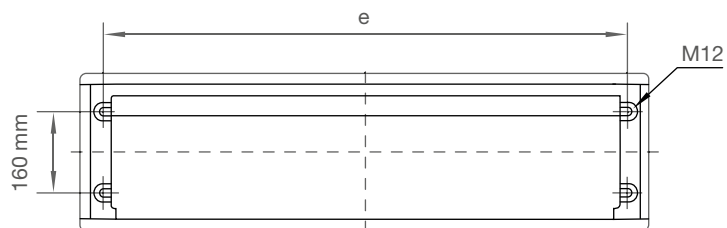


	e ±2 [mm]
ZAX015E	690
ZAX016E	1020
ZAX203E	1350

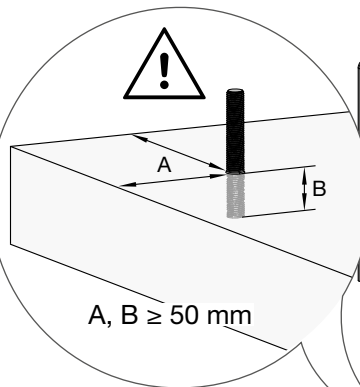

A, B ≥ 50 mm

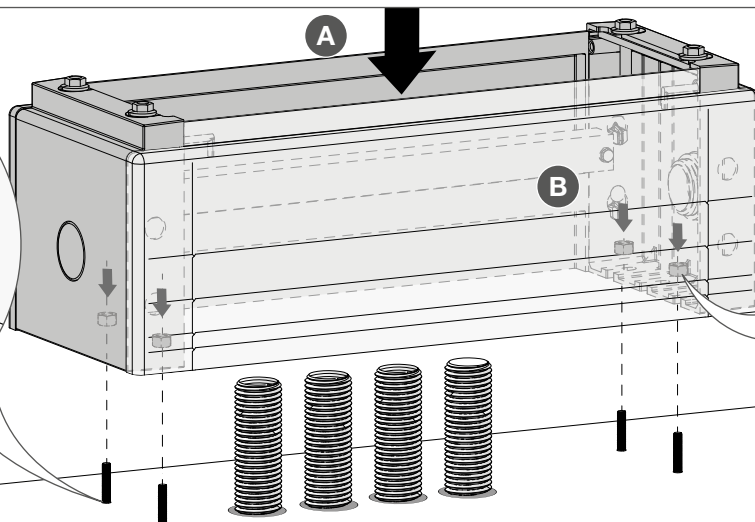

SW19

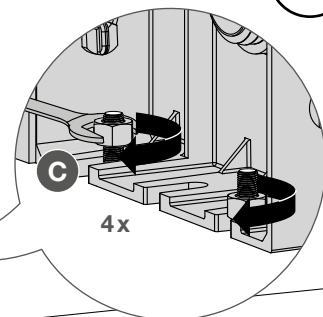

4x

