
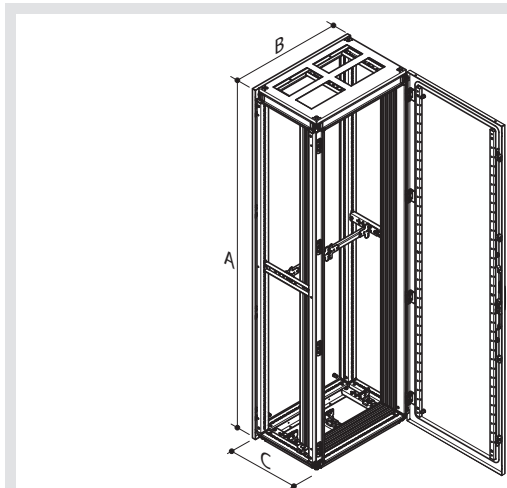
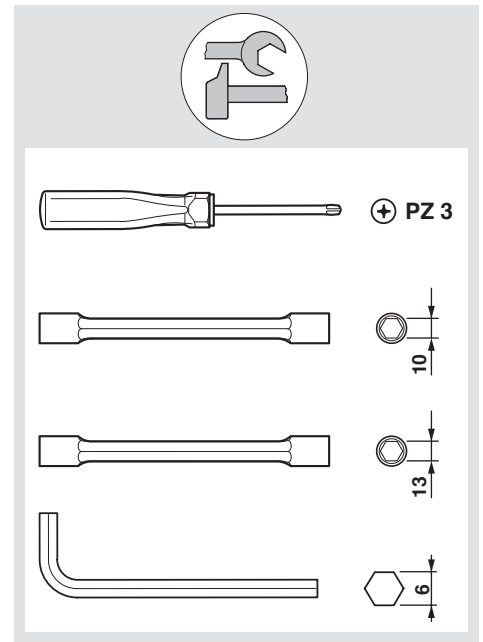
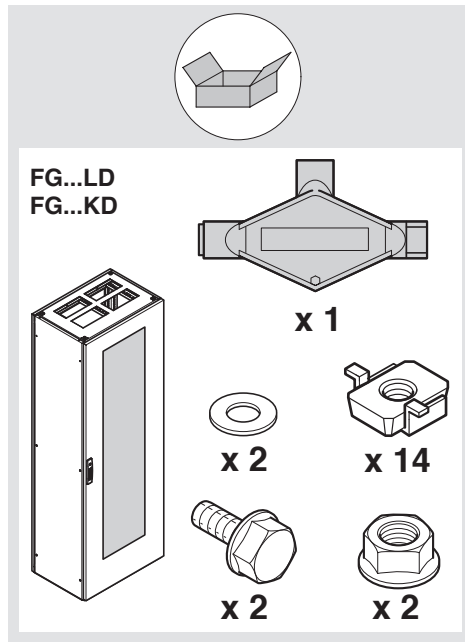
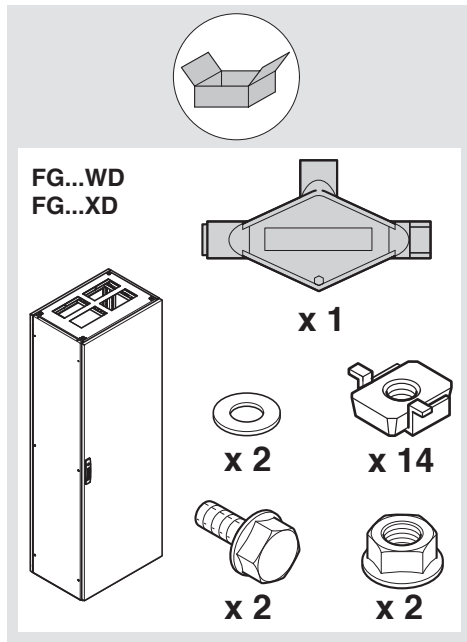


univers \perp

6L879400.3


- (DE) Montageanleitung
- (FR) Notice d'instructions
- (GB) Mounting instructions
- (NL) Montage instructie
- (DK) Monteringsvejledning
- (FI) Asennusohje
- (NO) Montasjeanvisning
- (SE) Monterings instruktioner
- (IT) Istruzioni di montaggio
- (ES) Instrucciones de montaje
- (PT) Instruções de montagem
- (CZ) Montážní návod
- (BA) Uputstvo za montažu

- (HR) Upute za montažu
- (HU) Szerelési útmutató
- (LT) Montavimo instrukcija
- (LV) Montāžas instrukcija
- (PL) Instrukcja montażowa
- (RO) Instrucțiuni de montare
- (SK) Návod na montáž
- (RU) Инструкция по монтажу
- (BG) Инструкции за монтаж
- (GR) Οδηγίες χώνευσης
- (SI) Navodilo za montažo
- (EE) Paigaldusjuhised
- (IS) Leiðbeiningar
- (AE) دليل التثبيت

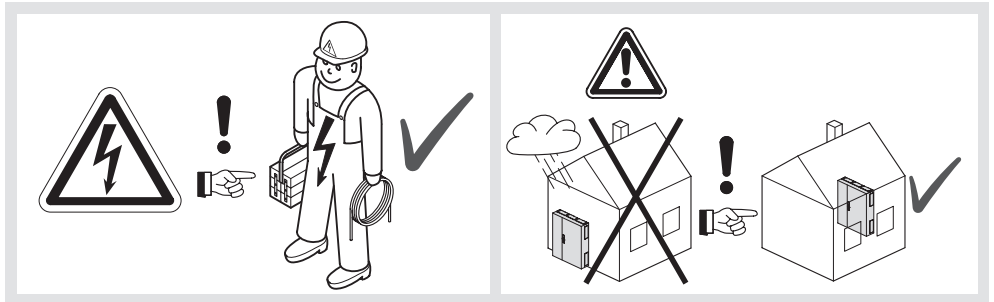


		A	B	C
FG21WD	FG21LD	1900	350	400
FG22WD	FG22LD	1900	600	400
FG23WD	FG23LD	1900	850	400
FG24WD	FG24LD	1900	1100	400
FG25WD	FG25LD	1900	1350	400
FG26WD	FG26LD	1900	1600	400
FG21XD	FG21KD	1900	350	600
FG22XD	FG22KD	1900	600	600
FG23XD	FG23KD	1900	850	600
FG24XD	FG24KD	1900	1100	600
FG25XD	FG25KD	1900	1350	600
FG26XD	FG26KD	1900	1600	600


6L879400.3

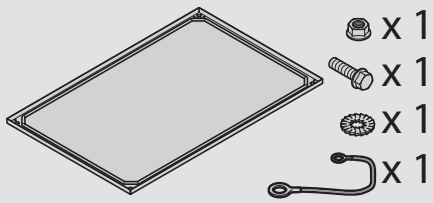


	C:400	C:600
B: 350	FZ881D	FZ751D
B: 600	FZ882D	FZ752D
B: 850	FZ883D	FZ753D
B: 1100	FZ884D	FZ754D
B: 1350	FZ885D	FZ755D
B: 1600	FZ886D	FZ756D

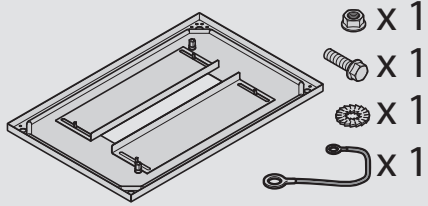




	C:400	C:600
B: 350	FZ871D	FZ761D
B: 600	FZ872D	FZ762D
B: 850	FZ873D	FZ763D
B: 1100	FZ874D	FZ764D
B: 1350	FZ875D	FZ765D
B: 1600	FZ876D	FZ766D

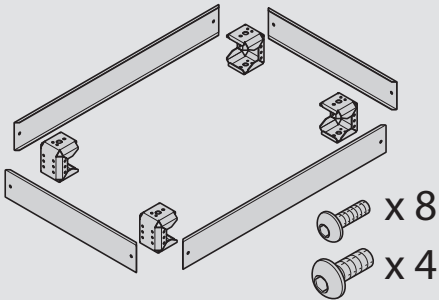

	C:400	C:600
B: 350	FZ901D	FZ921D
B: 600	FZ902D	FZ922D
B: 850	FZ903D	FZ923D
B: 1100	FZ904D	FZ924D
B: 1350	FZ905D	FZ925D
B: 1600	FZ906D	FZ926D

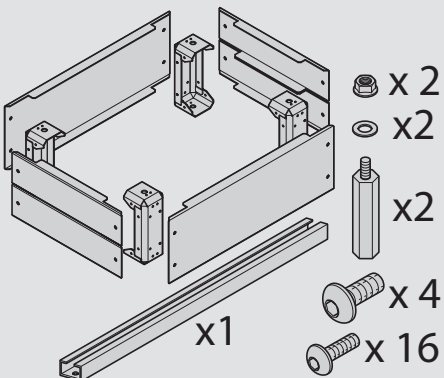


	C:400	C:600
B: 350	FZ931D	FZ941D
B: 600	FZ932D	FZ942D
B: 850	FZ933D	FZ943D
B: 1100	FZ934D	FZ944D
B: 1350	FZ935D	FZ945D
B: 1600	FZ936D	FZ946D


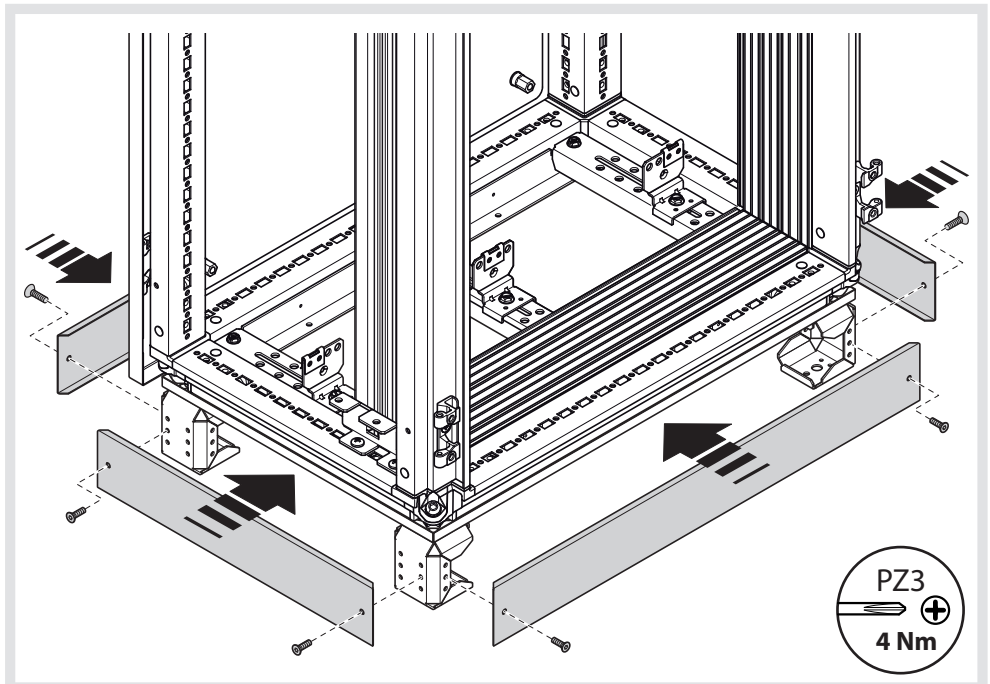
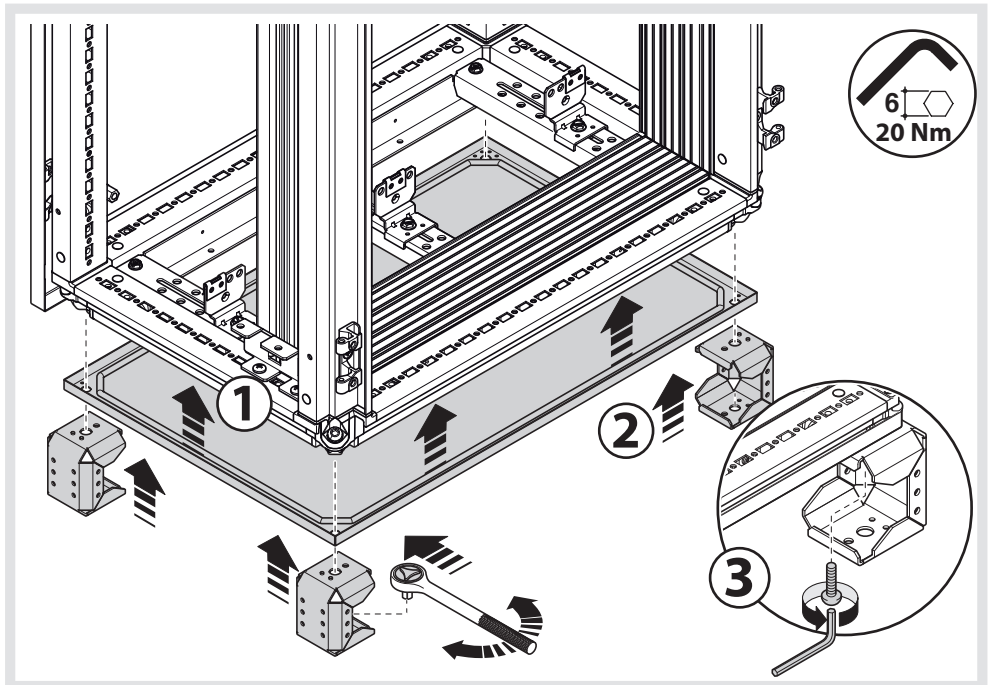
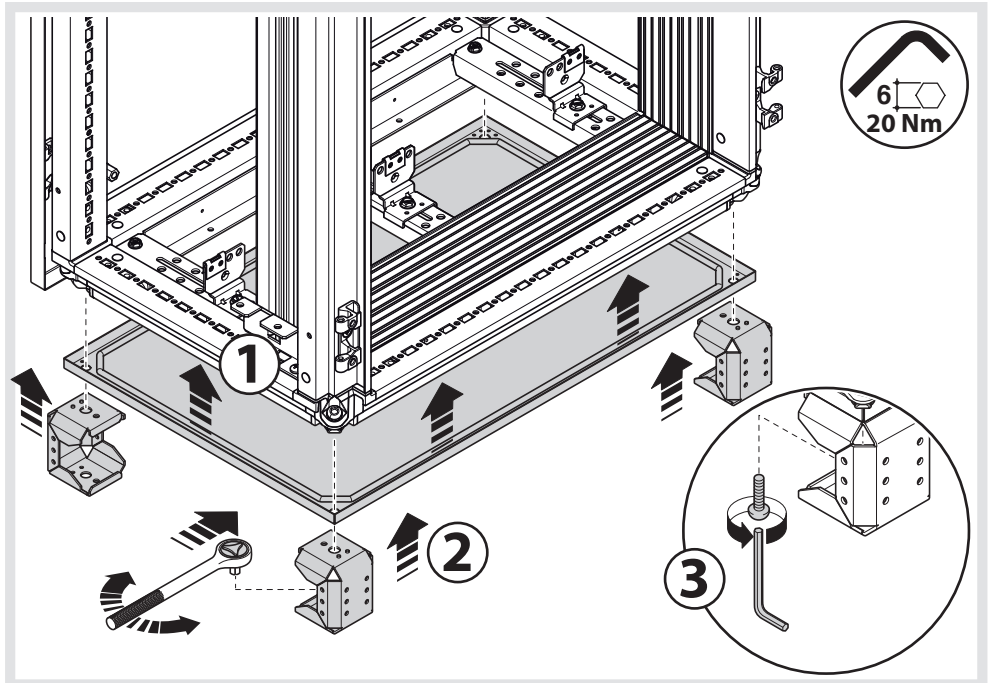


B: 350	FZ801N
B: 600	FZ802N
B: 850	FZ803N
B: 1100	FZ804N
B: 1350	FZ805N
B: 1600	FZ806N

 x2


 x2





 x2

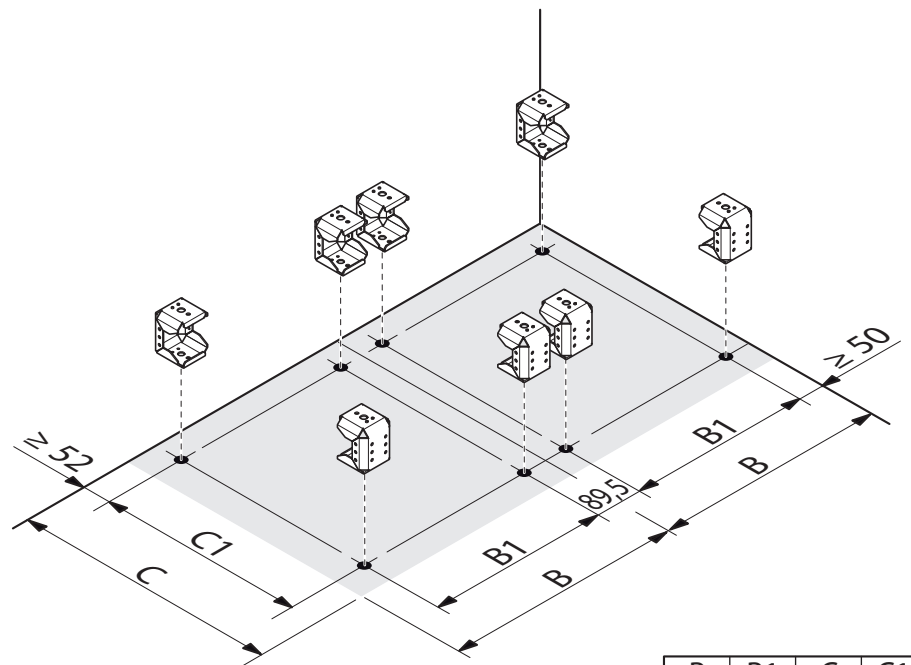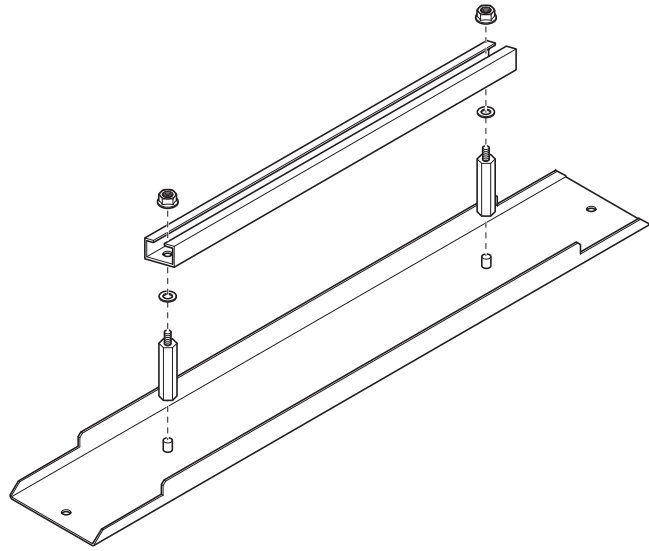
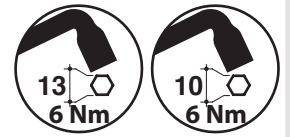
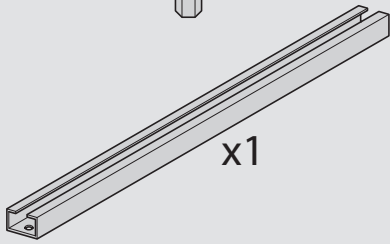









B	B1	C	C1
350	266	400	316
600	516	600	516
850	766	/	/
1000	1016	/	/
1350	1266	/	/
1600	1516	/	/

C: 400	FZ708D
C: 600	FZ709D

 
 x 2
  x 12
  x 4

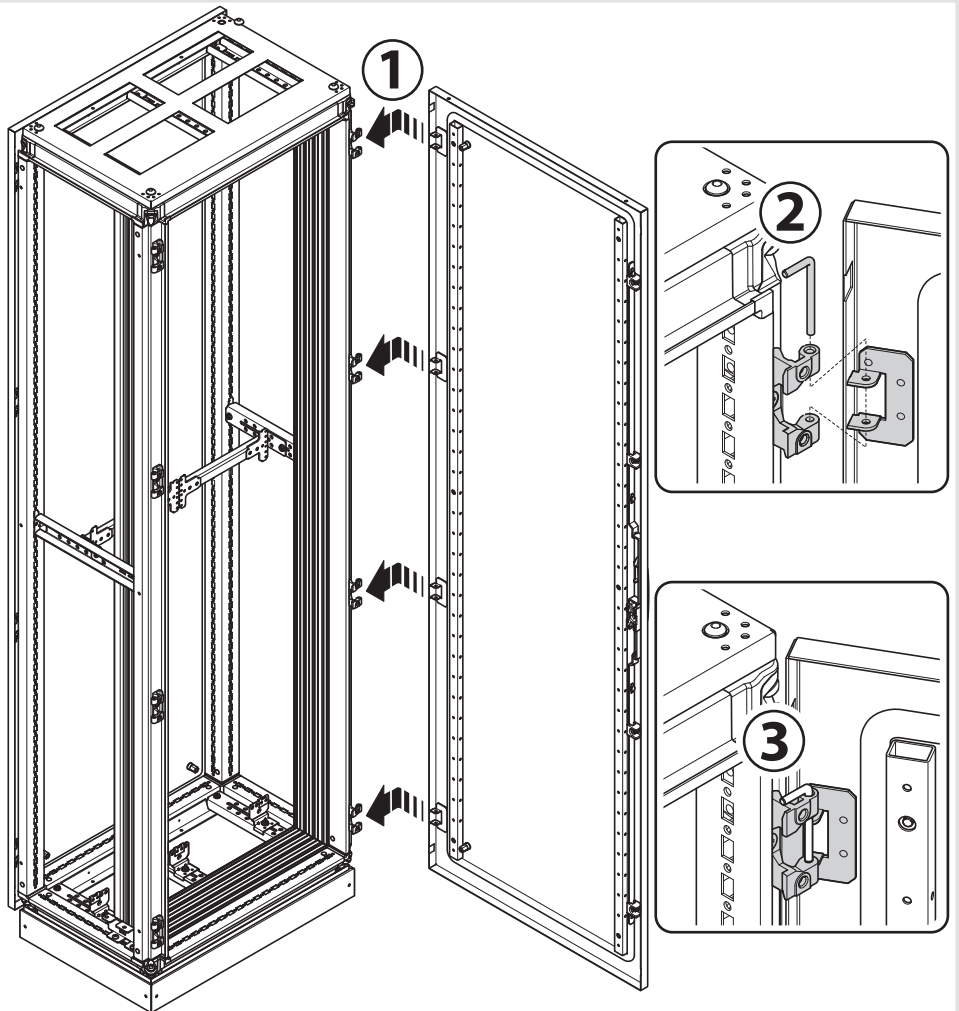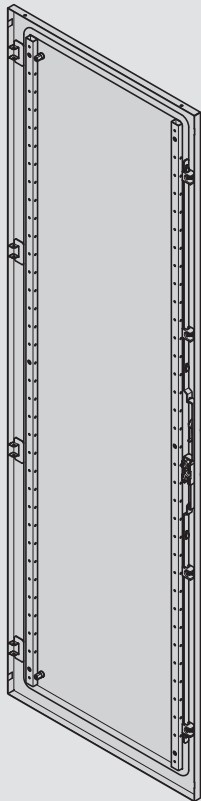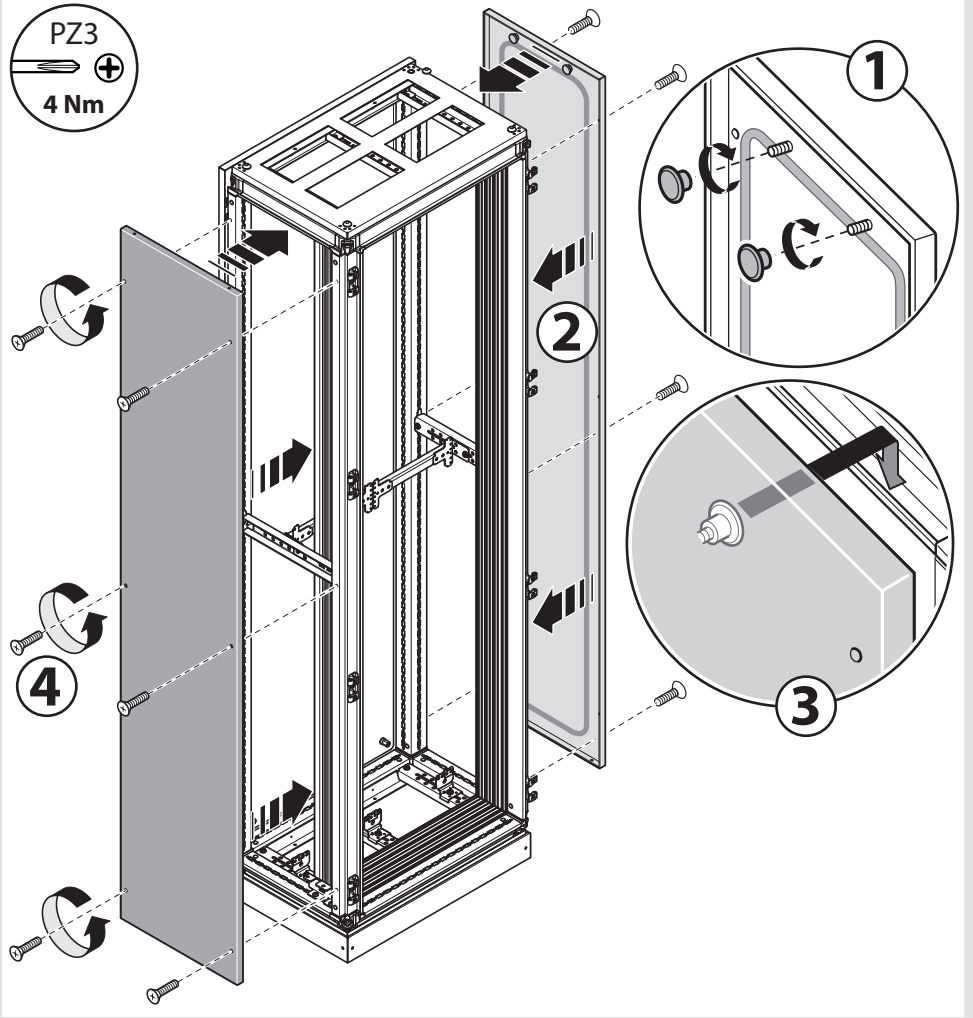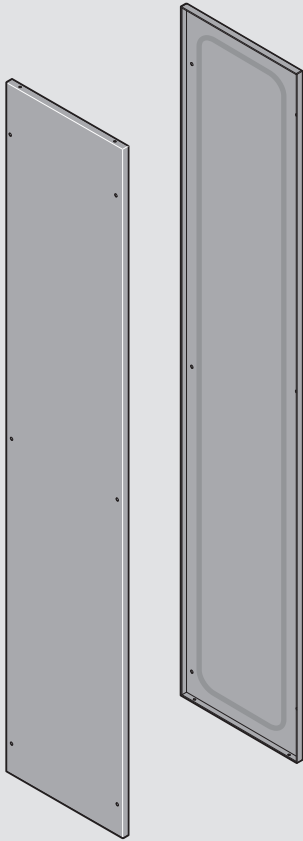

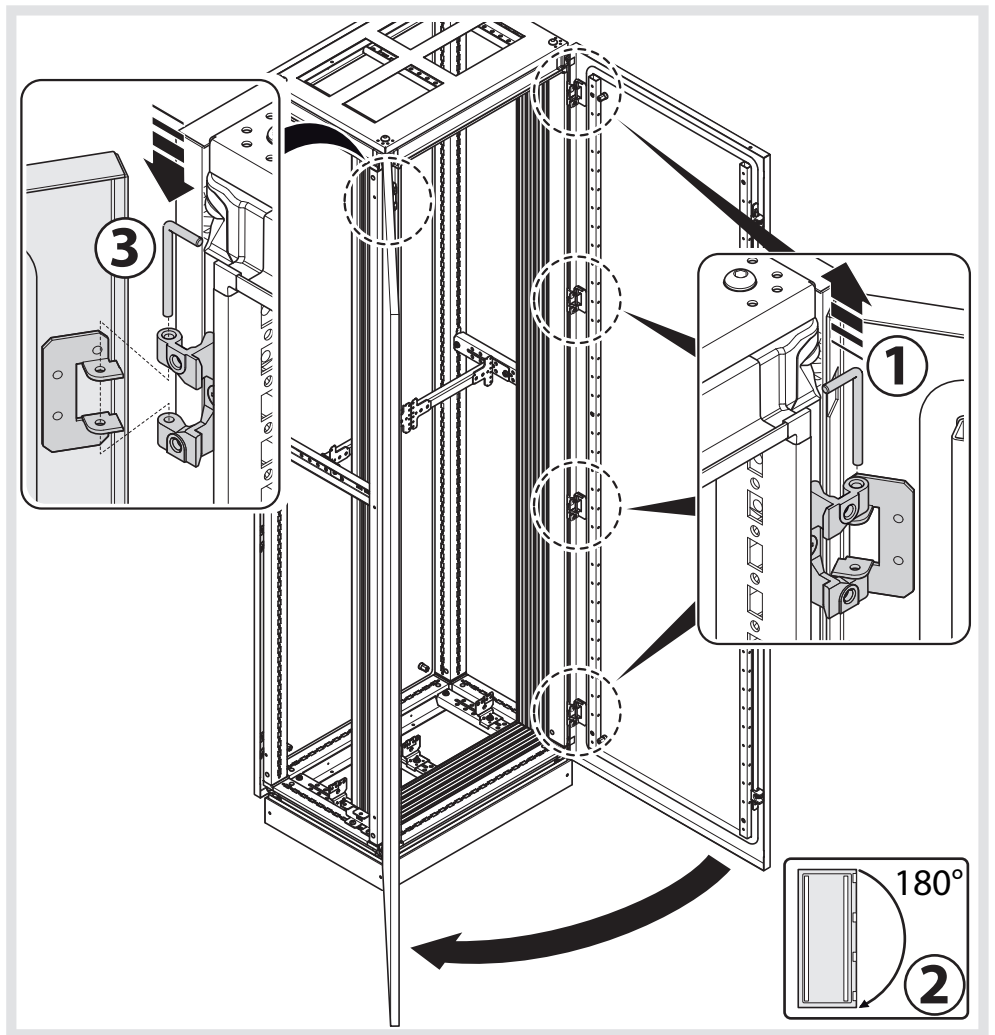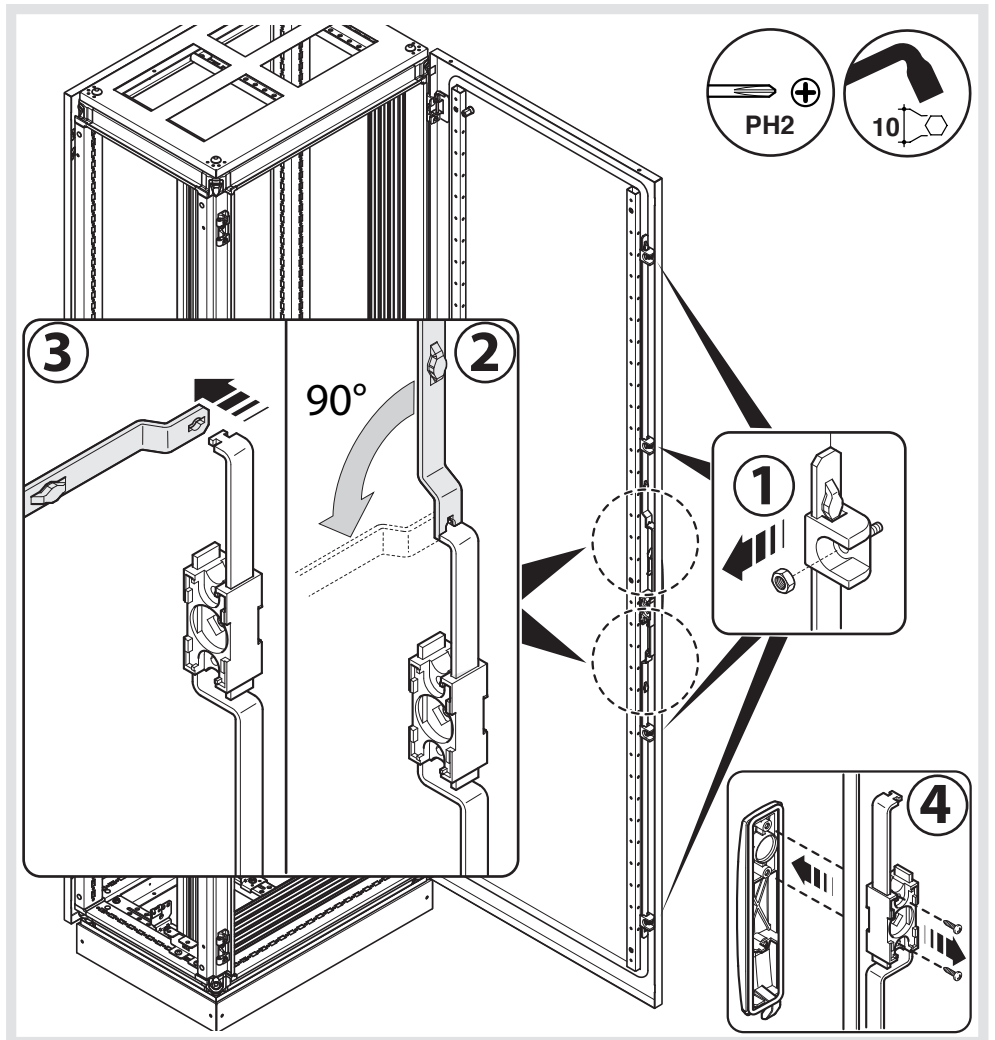
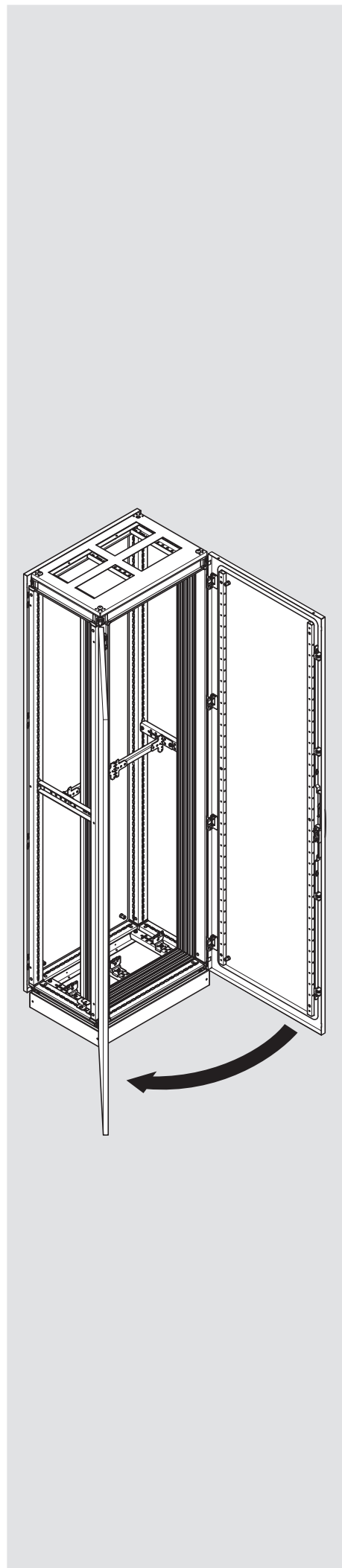


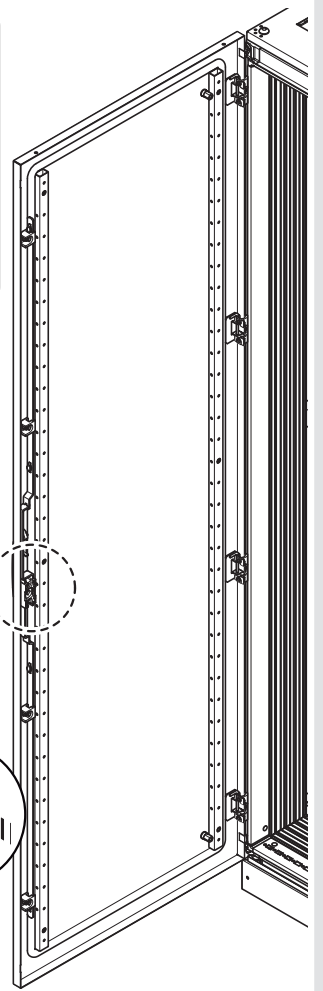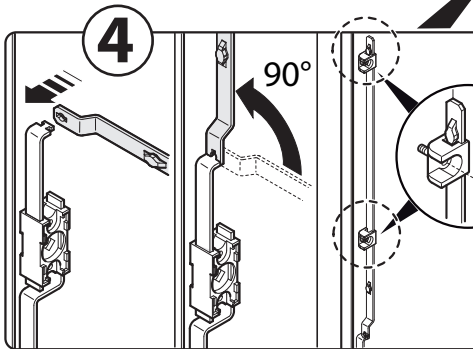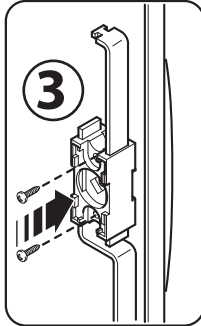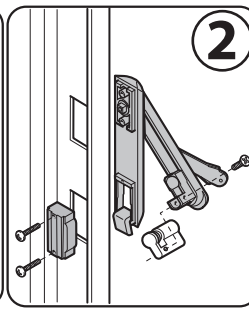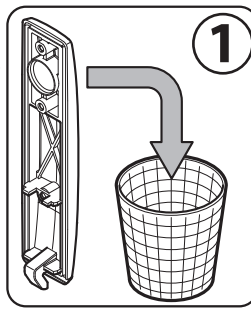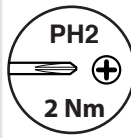


C: 400	UT81AN
C: 600	UT81BN

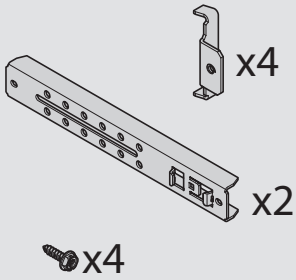


B: 350	UT81CN
B: 600	UT82CN
B: 850	UT83CN
B: 1100	UT84CN
B: 1350	UT85CN
B: 1600	UT86CN

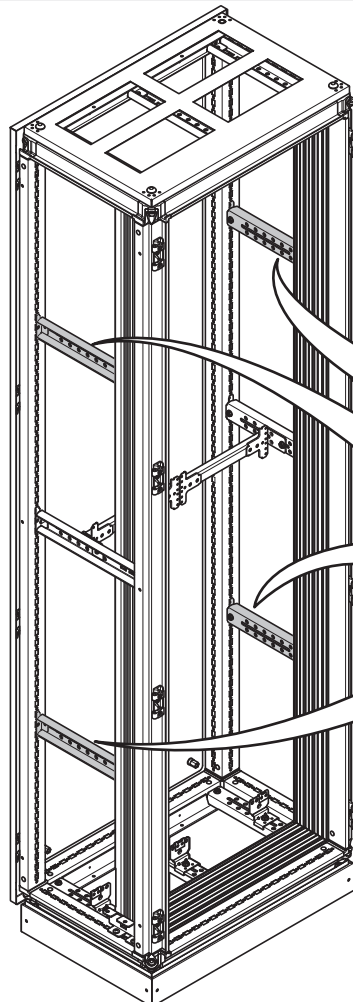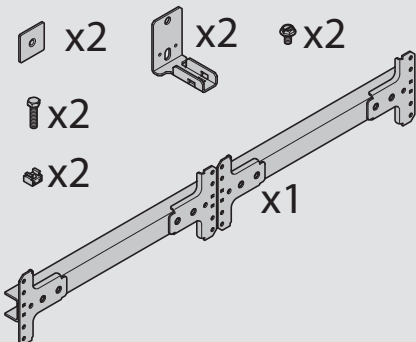





FZ767




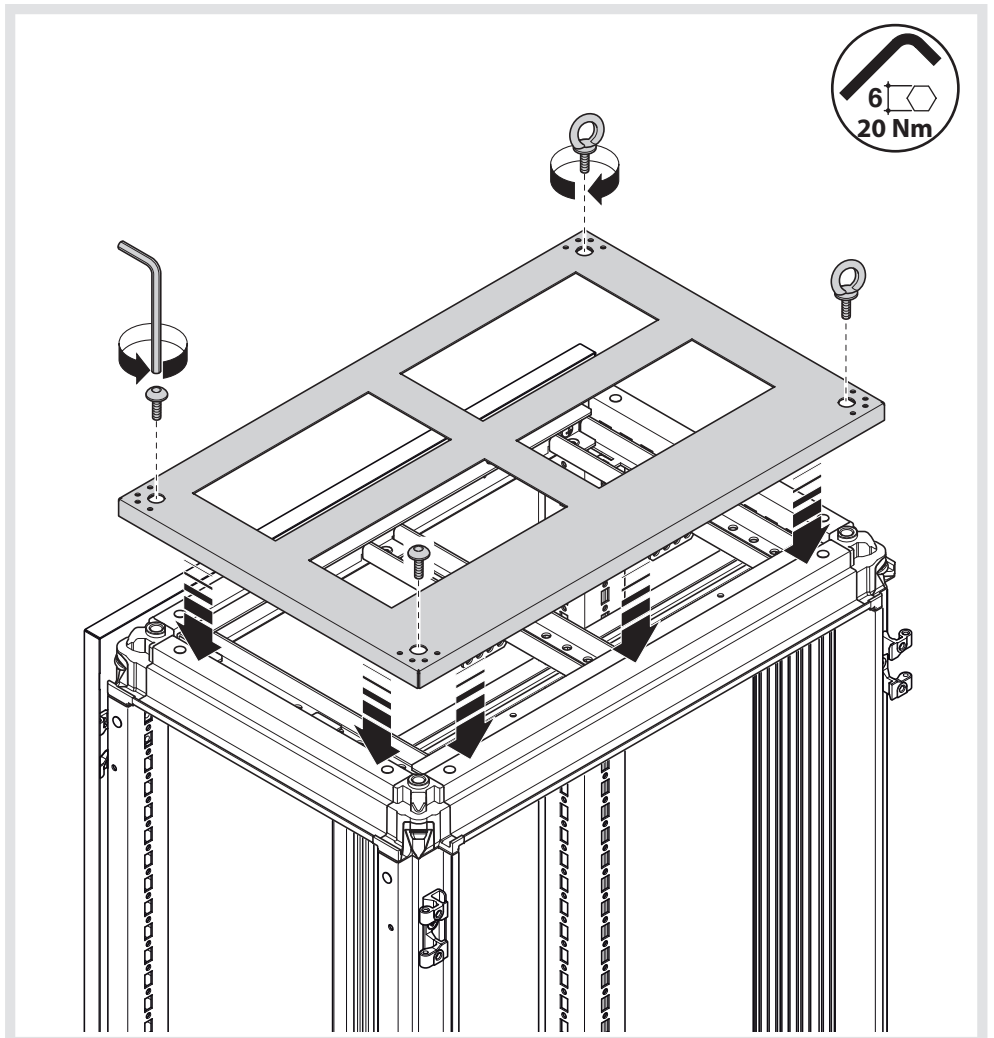







FZ760D






 








C: 400	FZ747D
C: 600	FZ748D

  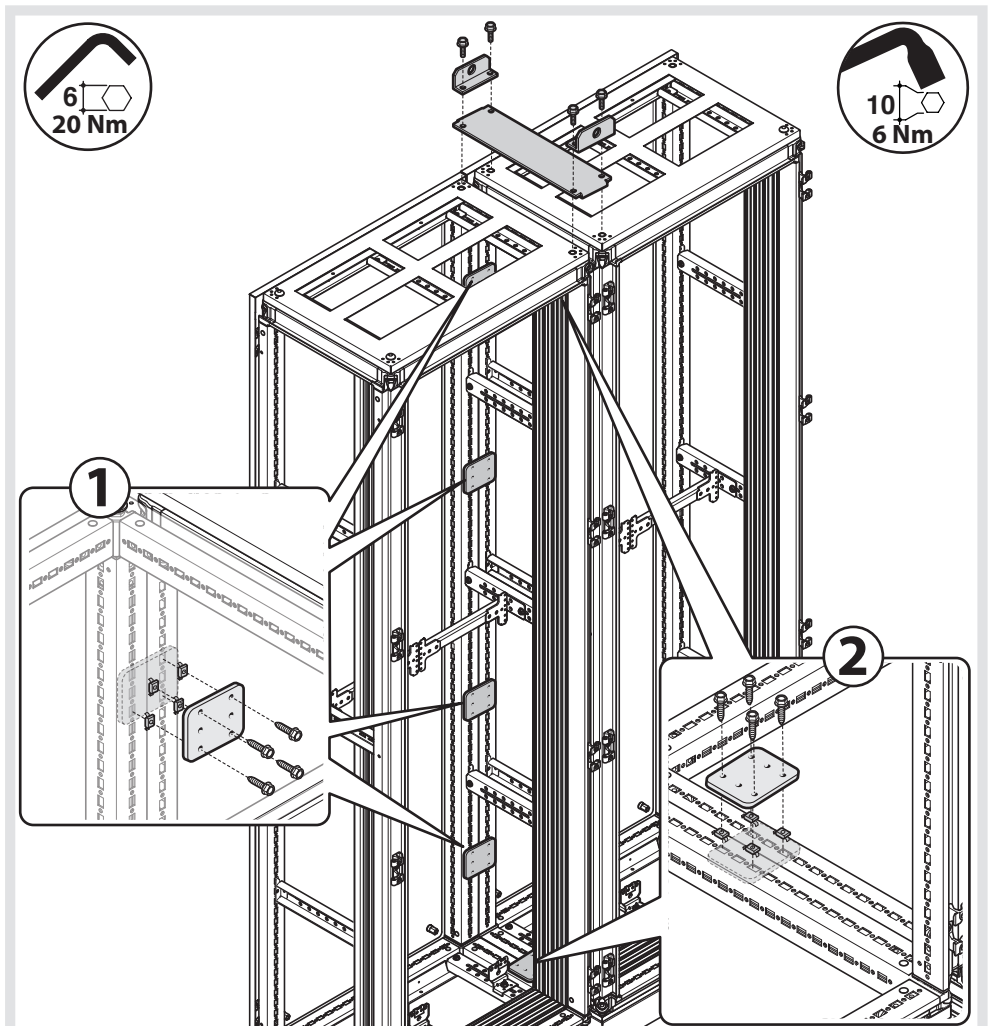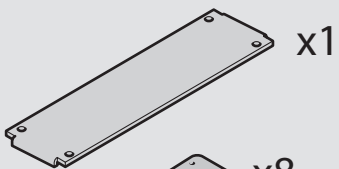

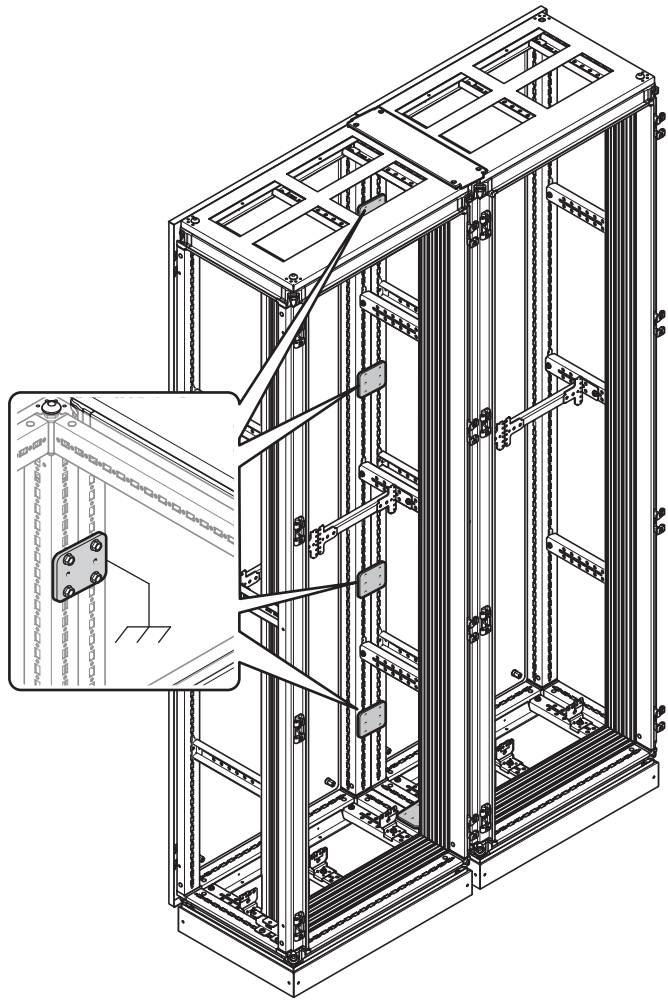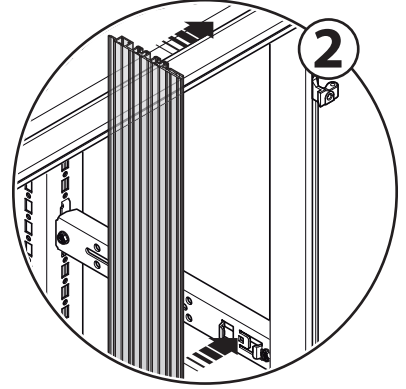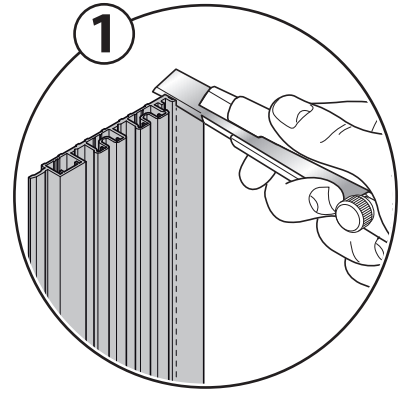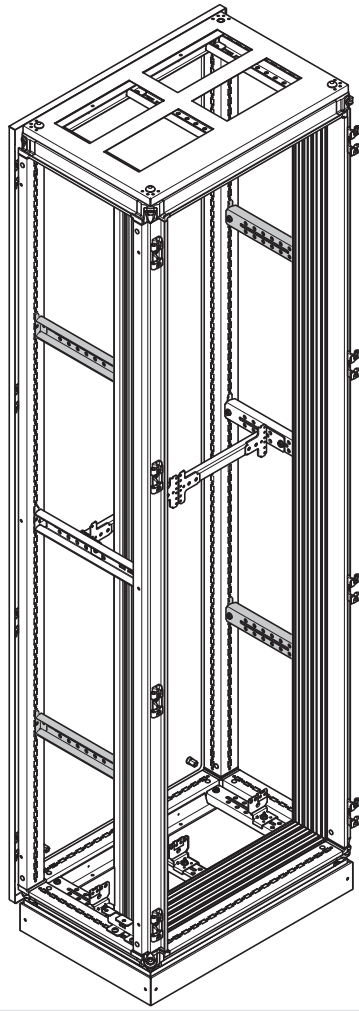

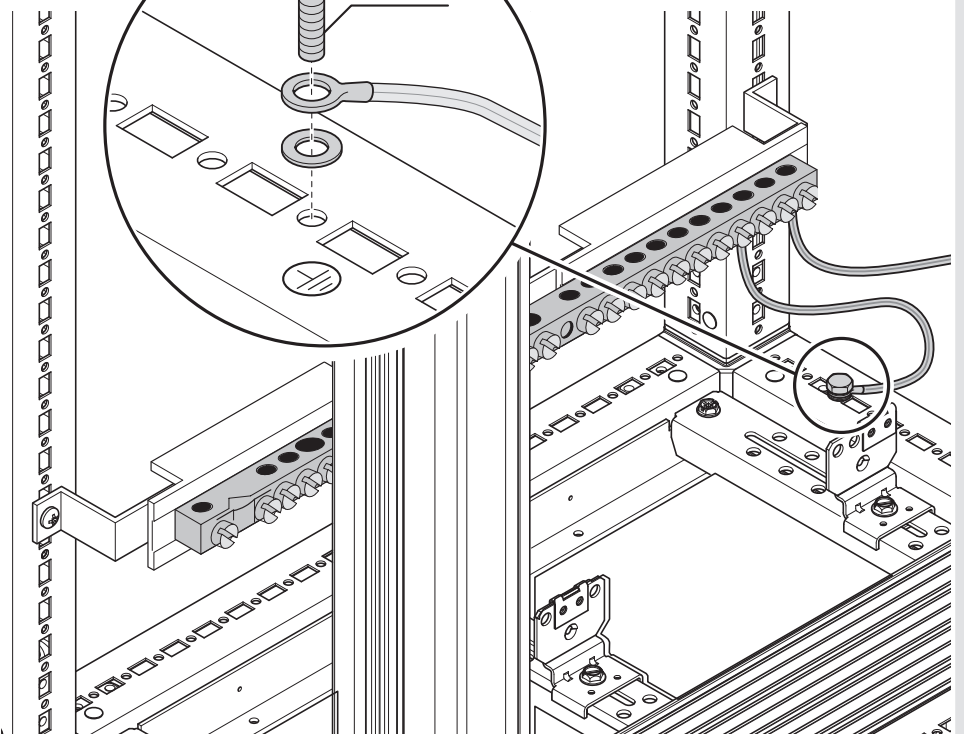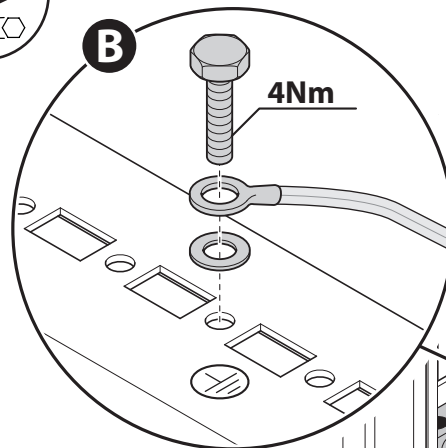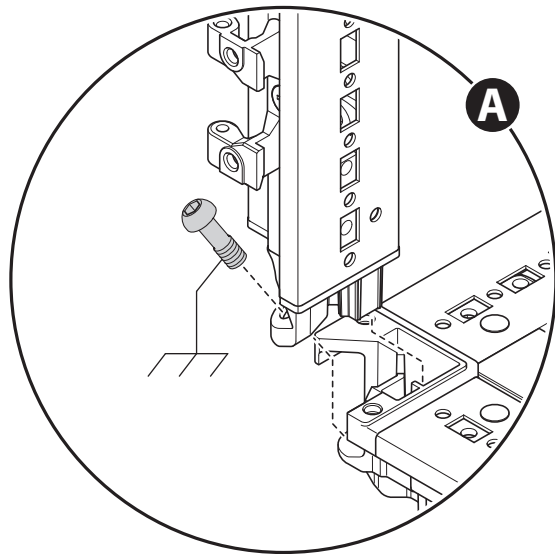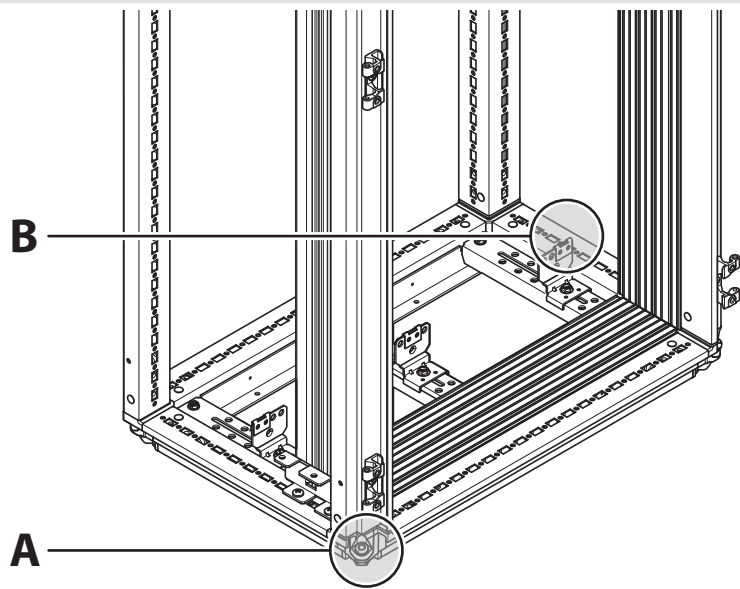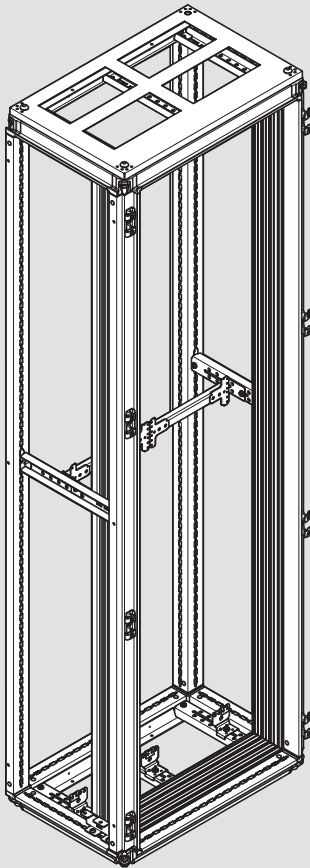

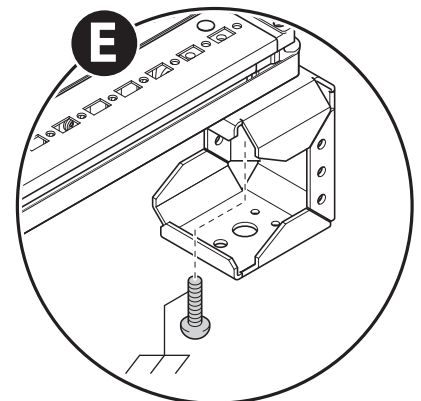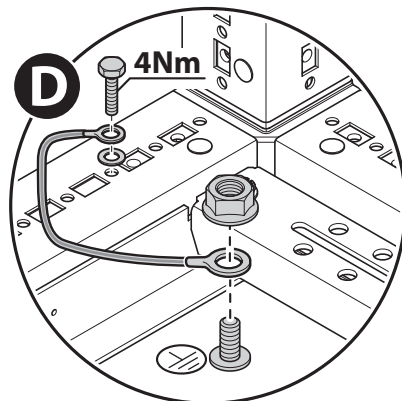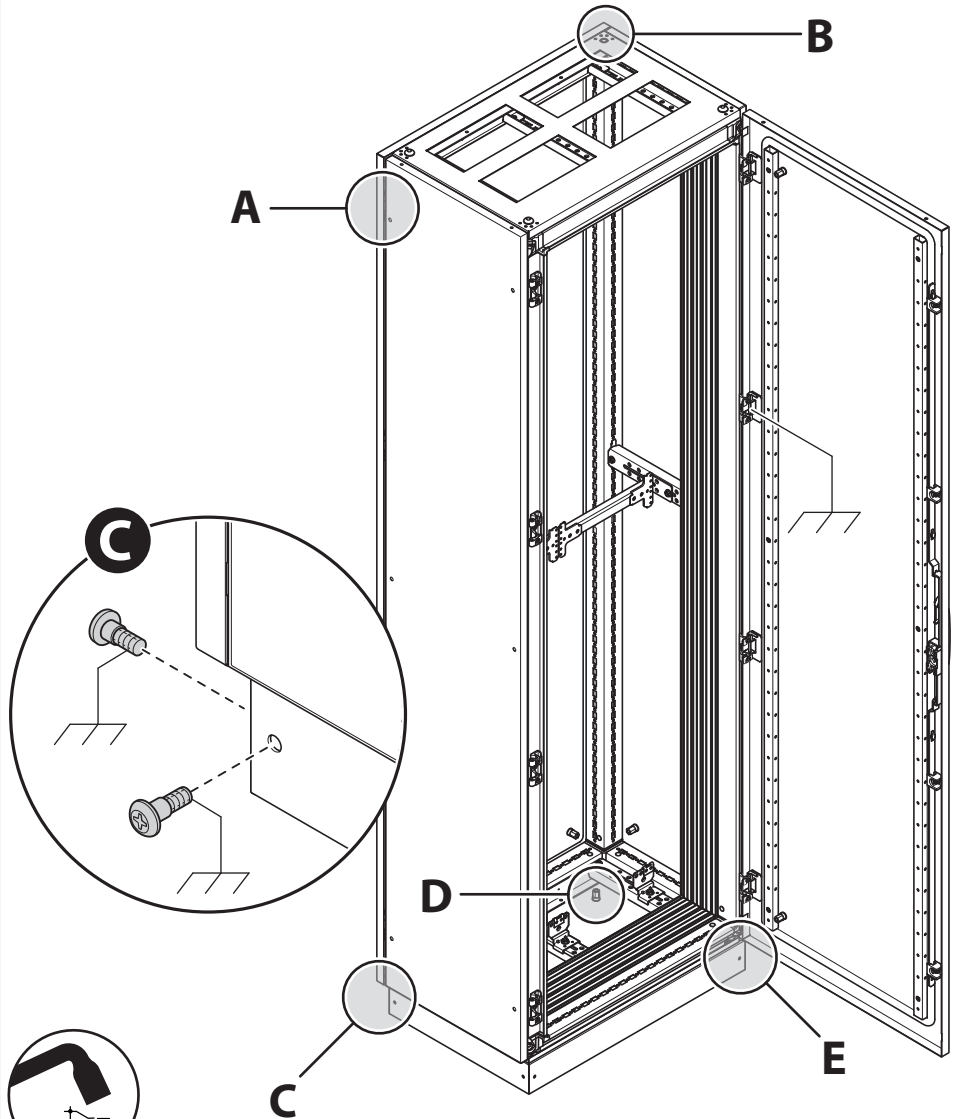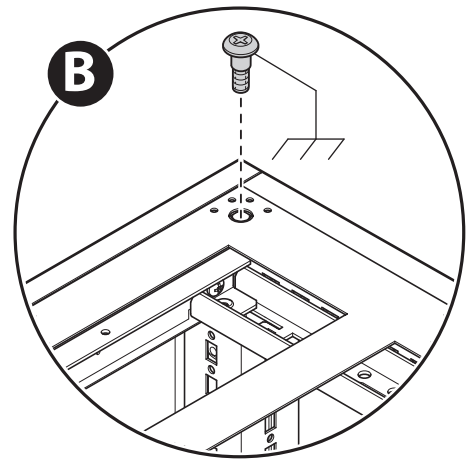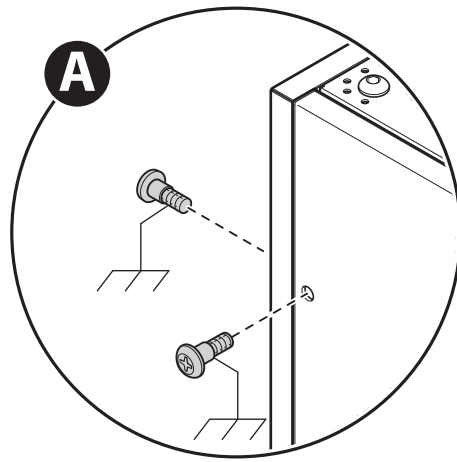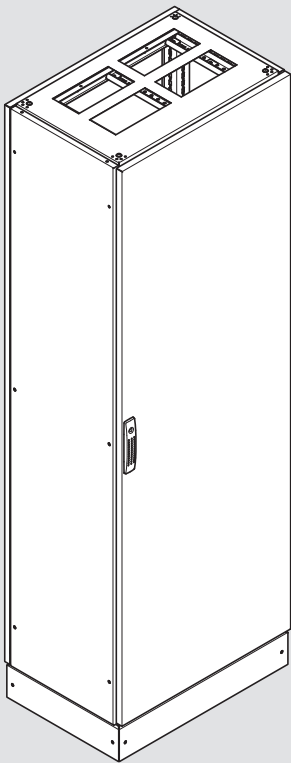

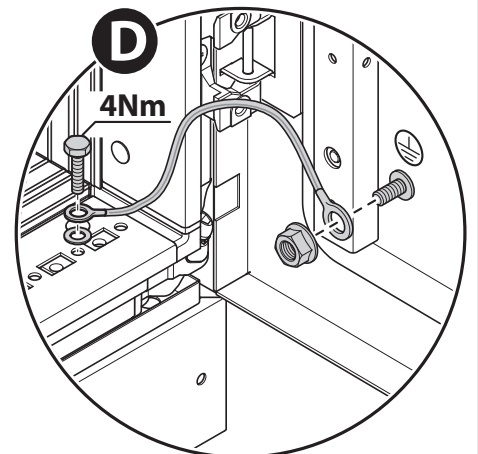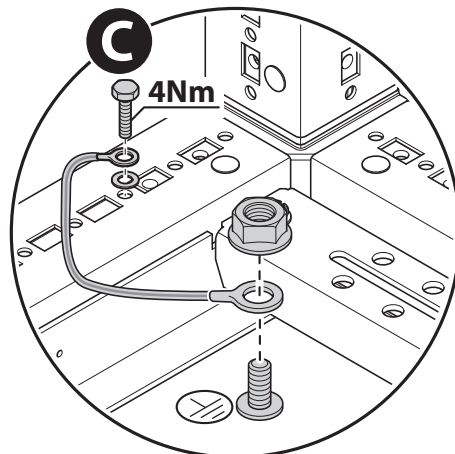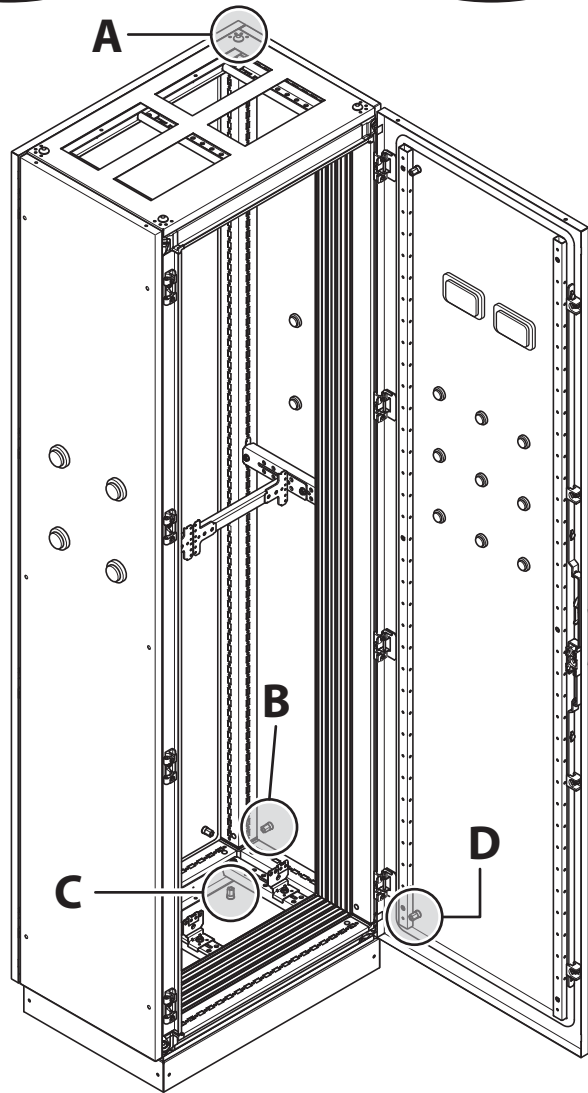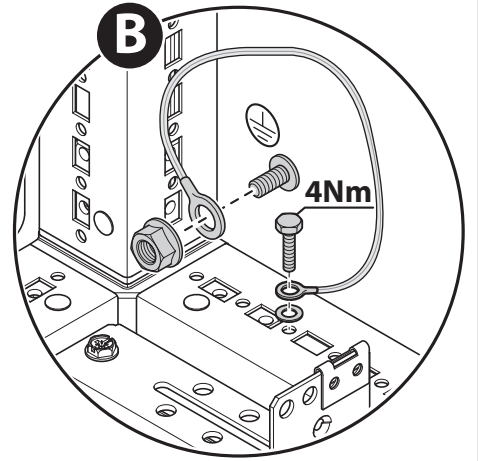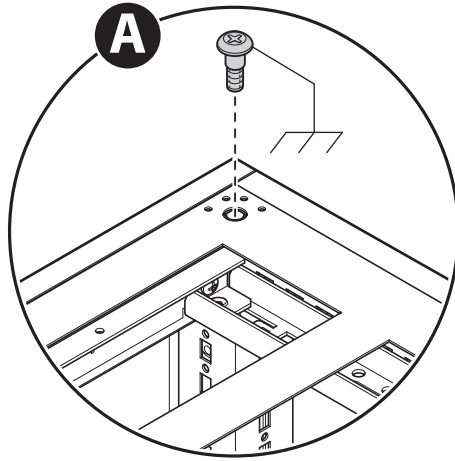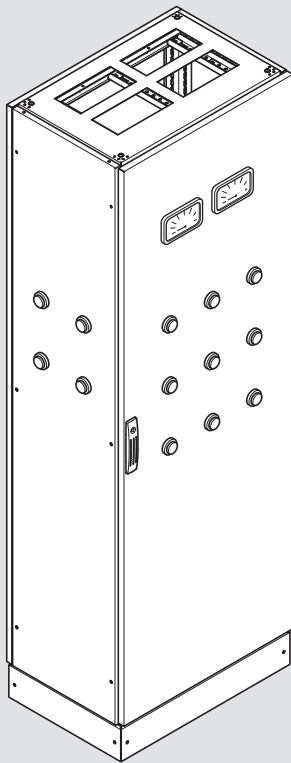

A	B	C
1900	350	
	600	
	850	400
	1100	600
	1350	
	1600	

